


AXOR

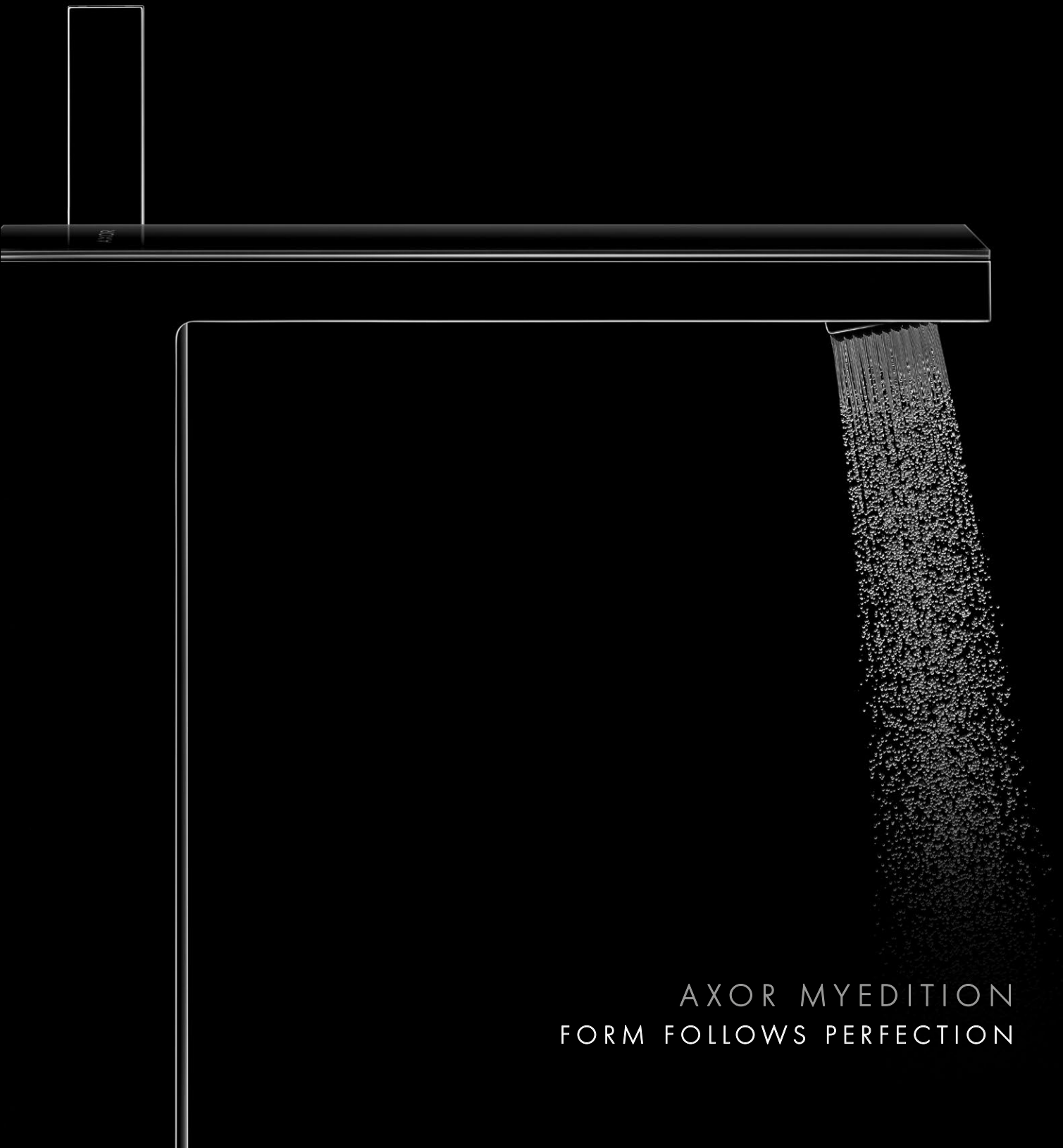

AXOR MY EDITION  
FORM FOLLOWS PERFECTION








AXOR MYEDITION

A PERSONAL STATEMENT.  
IN PERFECTION.

5

Setting oneself apart. Gratifying the need for uniqueness. Striking out in a new direction. This is what AXOR MyEdition stands for. Clear, linear design sets the stage for personal creativity. With a wide range of plates. Available in exclusive materials upon request. Individualisation. In perfection.

Design: Phoenix Design

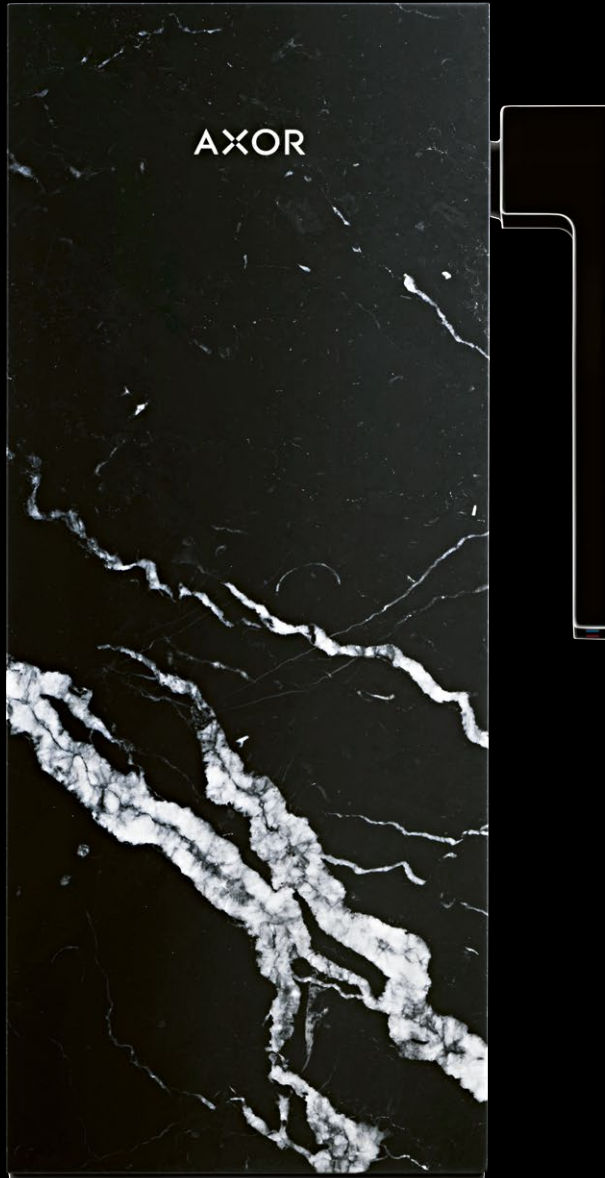



Constructed as if there were a single entity.  
Monolithic. Rectilinear. Reduced. Dominated by  
its rectangular design. Striking, from the plate to  
the handle. The generously sized plate creates  
a stage for one's own creativity. In Mirror Glass,  
Black Glass or other materials. Avant-garde for  
the age of individualisation.

A new concept for mixers. It starts with the metal body, chrome-plated or in one of 15 different AXOR FinishPlus surfaces. Crowned with a fascinating plate. With an exclusive portfolio of materials: Glass, metal, wood, marble, leather. AXOR Signature opens the door to path-breaking possibilities. More radiance. New sensuous experiences. Premiere with AXOR MyEdition. Another dimension of individualisation. In perfection.






Sophisticated materials, uniquely presented in the AXOR MyEdition plate. First, developed with painstaking care. Then, crafted with masterly precision. Finally, tested to the highest standards of quality and endurance. It's all part of the relentless pursuit of perfection.


A fascinating example: luxurious walnut veneer. Its journey from the tree to the mixer begins in America. The delicate sheets of wood are transformed into sturdy components with rich brown tones and beautiful patterns of striped grain.

Or white Lasa marble from South Tyrol, with exquisite gold veins. Chosen with care by one of the world's leading handlers. Cut with precision from the marble block for a stone veneer with an unparalleled surface feel. Its dark counterpart, Nero Marquina, from quarries in the Basque region in Northern Spain. An impenetrable black. With distinctive white veins. A maximum of elegance.

For leather, the selection is equally fastidious: resilient Nappa leather of European origin. Its edges are crafted with the utmost precision. Its handfeel is characteristically soft.

Distinctive originals. Each plate a unique specimen. The ultimate choice for washbasins and bathtubs.

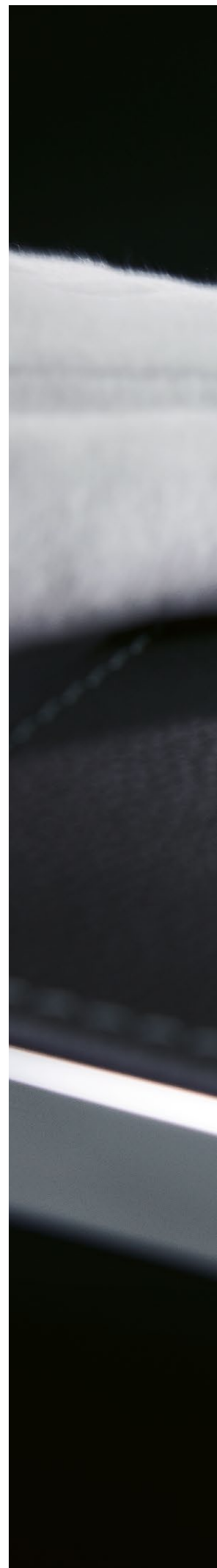

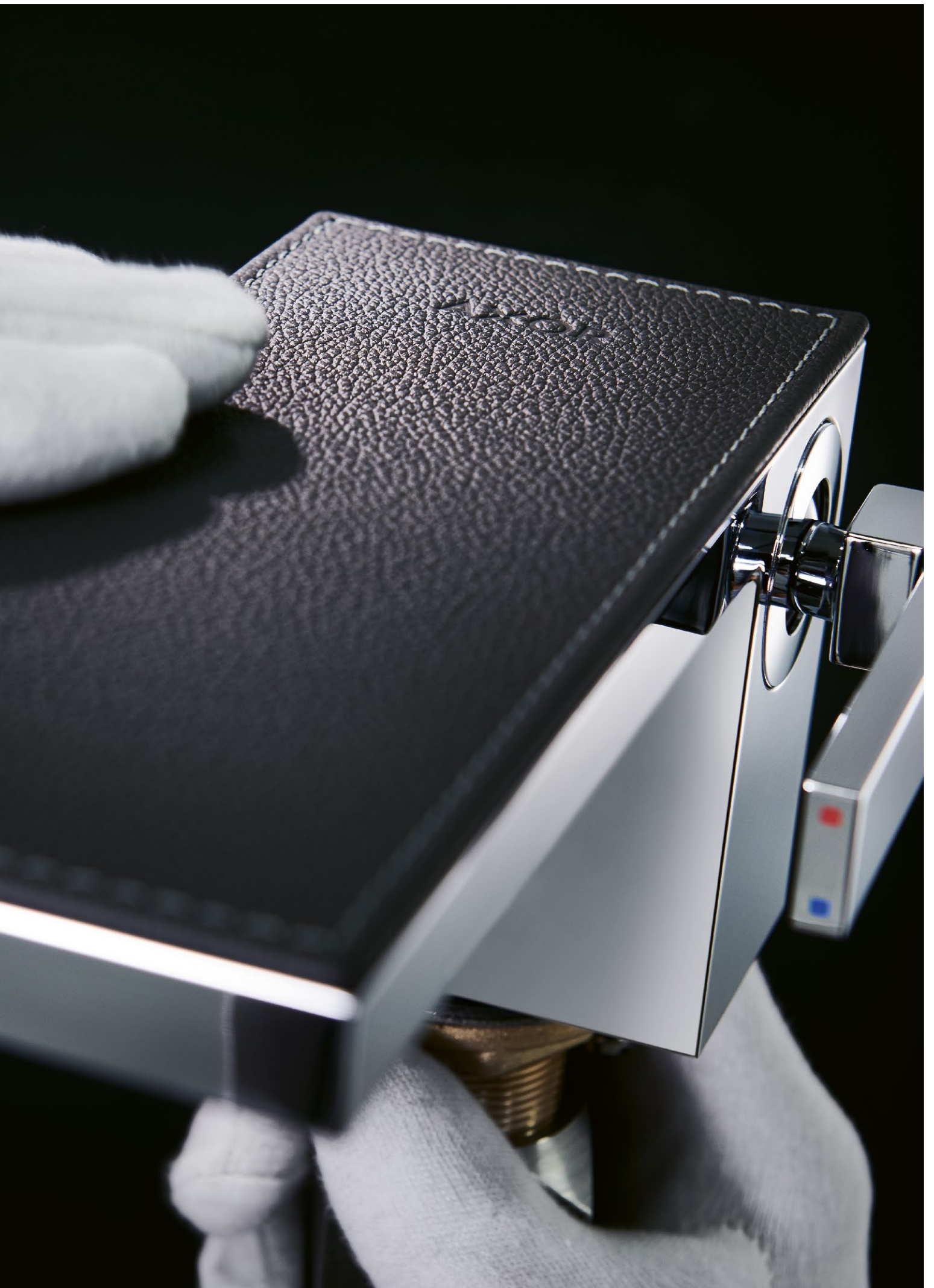



Polished Chrome



Brushed Chrome



Polished Gold Optic



Polished Nickel



Brushed Nickel




Polished Red Gold

12



Polished Bronze

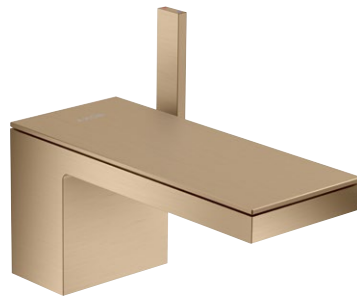

Brushed Bronze



Polished Black Chrome



Polished Brass




Brushed Brass



Stainless Steel Optic



Brushed Gold Optic

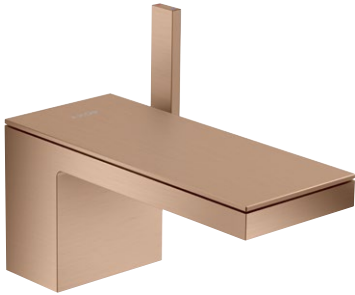

Brushed Red Gold



Brushed Black Chrome

True luxury lies in the fulfilling of one's personal dreams. The 15 exclusive PVD surfaces of AXOR FinishPlus set new standards of lustre, robustness and durability, with a maximum personal choice. From Gold Optic to Black Chrome. Brushed or polished. Unicolour or bicolour. Manufactured using state-of-the-art engineering. Applied to unique pieces and large-scale productions alike. 225 ways to express one's personality. Individualisation par excellence.



Brushed Black Chrome/Brushed Bronze



14



The merger of high technology and master craftsmanship: 15 AXOR FinishPlus surfaces with individual character. Each colour the result of intense development. Finished in the AXOR vacuum chambers using the most advanced Physical Vapor Deposition (PVD) processes: An arc of light erupts in the high vacuum. Gases fuse with zirconium. The mixture is applied to the Chrome surface of the tap fitting, adding exquisite colour and shine to the surface. The additional layer, up to 0.3 µm in thickness, makes the finish more robust. More resistant to scratches, cleaning agents and salty sea air.


More exclusive and refined. More sensual to the touch. Particularly with the brushed varieties. Finished by hand, the brush's direction carefully controlled to complement the design. Every step of the process bringing it closer to perfection.





Monoliths in the bathroom. Linear and clear. With two fascinating variables, height and plate material in Black Glass or Mirror Glass. Equally impressive is the gentle PowderRain technology. Its spray is the natural outcome of the architectonic design. Fine droplets envelop the hands, cocooning them in a sensuous mist.



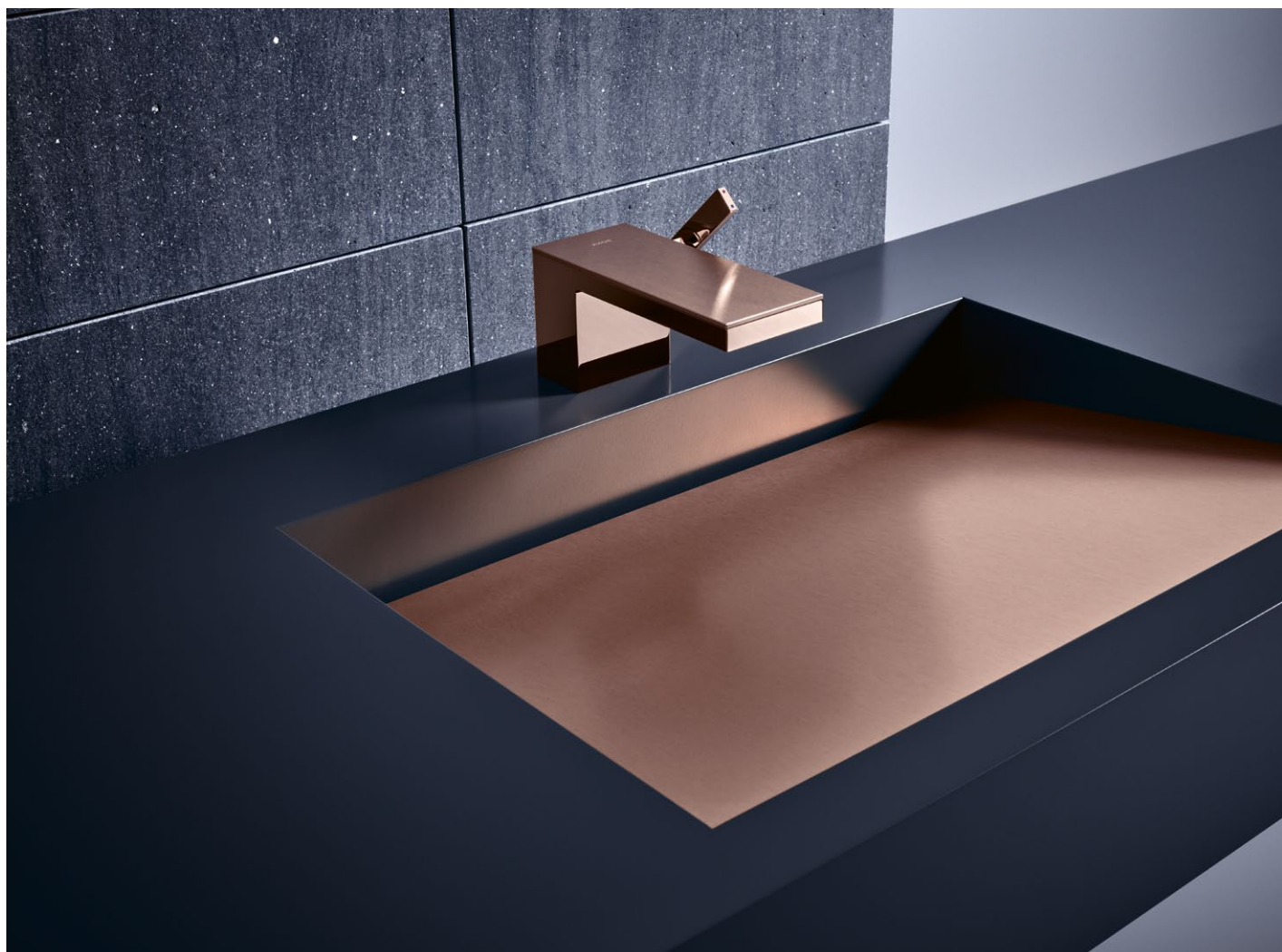



Polished and brushed. An exciting combination, sensuous to the touch. The surface finish enhances the radiance to perfection. As with AXOR FinishPlus polished and brushed surfaces in Red Gold. Available together as a bicolour version. The ultimate expression of an extravagant personality.



A statement in the bathroom: the AXOR MyEdition floor-standing washbasin mixer. Unmistakeable: the Brushed Black Chrome body combined with a Brushed Bronze plate.

The three-hole basin mixer in Chrome with Mirror Glass: Equally distinctive in its planarity, from plate to handles.



Materials with character. Such as the plate in Black Walnut veneer, a tribute to the beauty of nature. Perfect for the AXOR MyEdition wall-mounted washbasin mixer. For a total look, to be combined with a washbasin in matching Black Walnut.









Clean lines, perfect for the shower: The AXOR overhead shower 250/250 2jet, the AXOR thermostatic module Select for three outlets, and the AXOR baton hand shower. Their design may be minimalist, but their elegance fills the space. The overhead shower features PowderRain water design for a concentrated, enveloping spray. Controlled intuitively with innovative Select technology. A highlight in the shower. The perfect complement to AXOR MyEdition.





Individualisation continues to the bathtub. Monolithic and striking: the floor-standing bathtub mixer, its white marble plate making an unmistakable statement. No less masterful: The four-hole bathtub mixer with its plate of luxurious black marble.

## WASH BASIN

---



Single lever basin mixer 70,  
with push-open waste set  
# 47010, -000, -600



Single lever basin mixer 230,  
with push-open waste set  
# 47020, -000, -600



Single lever basin mixer,  
for concealed installation,  
wall-mounted  
# 47060, -000, -600

Basic set  
# 13623180



3-hole basin mixer 70,  
with push-open waste set  
# 47050, -000, -600



Single lever basin mixer floor-standing,  
with push-open waste set  
# 47040, -000, -600

Basic set  
# 10452180

## BIDET

---

28



Single lever bidet mixer,  
with push-open waste set  
# 47210, -000, -600

## BATHTUB

---



Bath spout, wall-mounted  
# 47410, -000, -600



4-hole rim mounted bath mixer  
# 47430, -000, -600

Basic set  
# 15480180



Single lever bath mixer  
floor-standing  
# 47440, -000, -600

Basic set  
# 10452180

## SHOWER PRODUCTS

---



Overhead shower 300/300 2jet,  
with shower arm  
# 35318, -000

Basic set  
# 35361180

Overhead shower 300/300 1jet,  
with shower arm (not shown)  
# 35314, -000

Overhead shower 250/250 2jet,  
with shower arm (not shown)  
# 35310, -000

Basic set  
# 35361180

Overhead shower 250/250 1jet,  
with shower arm (not shown)  
# 35306, -000



Overhead shower 250/250 2jet,  
with ceiling connector  
# 35312, -000

Basic set  
# 26434180

Overhead shower 250/250 1jet,  
with ceiling connector (not shown)  
# 35308, -000

Basic set  
# 26434180

Overhead shower 300/300 2jet,  
with ceiling connector (not shown)  
# 35320, -000

Basic set  
# 26434180

Overhead shower 300/300 1jet,  
with ceiling connector (not shown)  
# 35316, -000

Basic set  
# 26434180



Overhead shower 250/250 2jet,  
ceiling-exposed  
# 35313, -000

Basic set  
# 35363180

Overhead shower 250/250 1jet,  
ceiling-exposed (not shown)  
# 35309, -000

Basic set  
# 35363180

Overhead shower 300/300 2jet,  
ceiling-exposed (not shown)  
# 35321, -000

Basic set  
# 35363180

Overhead shower 300/300 1jet,  
ceiling-exposed (not shown)  
# 35317, -000

Basic set  
# 35363180



Overhad shower 460/300 3jet,  
with shower arm and square escutcheons  
# 35282, -000

Basic set iBox universal  
# 01700180

Overhad shower 460/300 2jet,  
with shower arm and square escutcheons  
(not shown)  
# 35280, -000

Basic set iBox universal  
# 01700180

Overhad shower 460/300 1jet,  
with shower arm and square escutcheons  
(not shown)  
# 35278, -000



Overhead shower 250/580 3jet  
# 35283, -000

Basic set iBox universal  
# 01700180



Porter unit 120/120  
# 12626, -000



Baton hand shower 2jet  
# 28532, -000



Metal effect shower hose 1.25 m  
# 28282, -000

Chrome (-000)

All products in the AXOR MyEdition collection and all complementary products can be found on [axor-design.com](http://axor-design.com)

THERMOSTATIC MODULES



ShowerSelect valve Square,  
for 3 outlets, for concealed installation  
# 36717, -000

Basic set iBox universal  
# 01700180



ShowerSelect thermostatic mixer  
highflow Square,  
for concealed installation  
# 36718, -000

Basic set iBox universal  
# 01700180



ShowerSelect thermostatic mixer  
Square, for 2 outlets  
with FixFit and Porter unit,  
for concealed installation  
# 36712, -000

Basic set iBox universal  
# 01700180



ShowerSelect thermostatic mixer  
Square, for 2 outlets,  
for concealed installation  
# 36715, -000

Basic set iBox universal  
# 01700180



ShowerSelect thermostatic mixer  
highflow Square, for 1 outlet  
and additional outlet,  
for concealed installation  
# 36716, -000

Basic set iBox universal  
# 01700180

ShowerSelect thermostatic mixer  
Square, for 1 outlet,  
for concealed installation (not shown)  
# 36714, -000

Basic set iBox universal  
# 01700180

30



Thermostatic module Select 460/90,  
for 2 functions, for concealed installation  
# 18355, -000

Basic set  
# 18310180



Thermostatic module Select 530/90,  
for 3 functions, for concealed installation  
# 18356, -000

Basic set  
# 18311180



Thermostatic module Select 600/90,  
for 4 functions, for concealed installation  
# 18357, -000

Basic set  
# 18312180

ACCESSORIES



Rail/Bath towel holder  
600 mm  
# 42832, -000



Double towel holder  
# 42821, -000



Liquid soap dispenser,  
with shelf  
# 42819, -000



Toothbrush tumbler  
# 42834, -000



Soap dish/shelf  
# 42803, -000

Chrome (-000)

All products in the AXOR MyEdition collection and all complementary products can be found on [axor-design.com](http://axor-design.com)

Australia – Hansgrohe Pty Ltd. / Level 1 / 123 Camberwell Rd / East Hawthorn / Victoria 3123  
Tel. +61 3 9811 9971 / info@hansgrohe.com.au / hansgrohe.com.au

Belgium – Hansgrohe N.V.-S.A. / Riverside Business Park / Blvd Internationalelaan 55 K / B-1070 Anderlecht  
Tel. +32 2 5430140 / Fax +32 2 5379486 / info@hansgrohe.be / axor-design.be

Croatia – Hansgrohe d.o.o. / Horvatova 82 / HR-10010 Zagreb  
Tel. +385-1-56-30-800 / Fax +385-1-56-30-899 / info@hansgrohe.hr / hansgrohe.hr

Dubai – Hansgrohe SE DMCC Branch / Swiss Tower, Cluster Y / Jumeirah Lakes Towers, Office 1904 / PO Box 34216  
Tel. +971 4 448 0200 / Fax +971 4 448 0299 / customerservice.mea@hansgrohe.com / hansgrohe-middleeast.com

Estonia – Hansgrohe Eesti / Mäealuse 2/1 / 12618 Tallinn  
Tel. +372 6826829 / info@hansgrohe.ee / hansgrohe.ee

Finland – Hansgrohe SE / Hansgrohe Suomi / Arabiankatu 12 / FIN-00560 Helsinki  
Tel. +358 (0) 207 931340 / info@hansgrohe.fi / hansgrohe.fi

Hungary – Hansgrohe Kft. / Forgách utca 11-13 / 1139 Budapest  
Tel. +36 1 2369090 / info@hansgrohe.hu / hansgrohe.hu

India – Hansgrohe India (Pvt.) Ltd. / Office No. 701 / Lunkad Sky Station / Viman Nagar / Pune - 411014 Maharashtra / India  
Phone No. +912066259500 / info@hansgrohe.in / hansgrohe.in

Japan – Hansgrohe Japan K.K. / Tennozu First Tower 2F / 2-2-4 Higashi Shinagawa / Shinagawa-ku / Tokyo 140-0002  
Tel. +81 3 5715-3073 / Fax +81 3 5715-3088 / info@hansgrohe.co.jp / hansgrohe.co.jp

Latvia – Hansgrohe Latvijas pārstāvniecība / SIA Aqua Studio / Raiņa iela 14 / 3913 Iecava  
Tel. +371 9229029 / info@hansgrohe.lv / hansgrohe.lv

Lithuania – Hansgrohe atstovybė / Santoza / Ulonų g. 5 / 08240 Vilnius  
Tel. +370 5 2043291 / info@hansgrohe.lt / hansgrohe.lt

Portugal – Hansgrohe / Riera Can Pahissa, 26 / 08750 Molins de Rei  
Tel. +34 93 6803900 / Fax +34 93 6803909 / info@hansgrohe.pt / hansgrohe.pt

Singapore – Hansgrohe Pte. Ltd. / 69 Mohamed Sultan Road / Singapore 239015  
Tel. +65 6884 5060 / Fax +65 6884 5071 / info@hansgrohe.com.sg / hansgrohe.com.sg

South Africa – Hansgrohe South Africa (pty) Ltd. / 30 Archimedes Street / Kramerville / Johannesburg 2090  
Tel. +27 11 445 0000 / Fax +27 11 445 0199 / sales@hansgrohe.co.za / hansgrohe.co.za

Sweden – Hansgrohe AB / Telefon +46 (0) 31-21 66 00 / Fax +46 (0) 31-19 01 03 / info@hansgrohe.se / hansgrohe.se

 
United Kingdom – Hansgrohe Limited / Units D1 and D2 / Sandown Park Trading Estate / Royal Mills / KT10 8BL Esher Surrey  
Tel. +44 (0) 1372 472 001 / Fax +44 (0) 1372 470 670 / customerservice@hansgrohe.co.uk / pro.hansgrohe.co.uk

# AXOR



AXOR / Hansgrohe SE  
Austraße 5-9  
77761 Schiltach  
Germany

info@axor-design.com  
axor-design.com



en-AXOR MyEdition / Subject to technical alterations and colour differences due to the printing process.  
Form-Nr. 84090439 / 10/18/372 / Printed in Germany / Printed on 100% chlorine free bleached paper.