



GUARDING WHAT MATTERS

Gates | Welded Wire | Accessories



WALLACE
PERIMETER SECURITY



PERIMETER SECURITY

starts with service

We promise to:

1. Respond to your email the same day we receive it.
2. Deliver site-specific drawings within 48 hours.
3. Have samples and specifications available on demand.
4. Have your quote in your inbox within 24 hours.
5. Never just take your order. Count on us to offer options, advice and ideas.

Put us to the test on your next project.

FOLDING GATES

Folding gates are designed to save space and time. The quick open/close cycle helps to accurately control access at the busiest traffic environments. Folding gates do not require as much room as other gates, saving valuable space for other uses. The compact installation allows for effective security installations in the most confined spaces.

Folding gates are available in a variety of models to suit many applications and budgets. The gates have nearly limitless design options to match any project exterior.

Factory assembly and testing ensures a smooth and reliable installation.

FOLDSMART SPEEDGATE

The FoldSmart is designed for everyday use in a wide variety of applications. Built on the proven mechanical elements of the PDXT, the FoldSmart achieves a perfect balance of reliability and cost effectiveness. Built-in battery backup and 24 programmable features ensure a user friendly solution. ▼




SCAN TO
WATCH
VIDEO

PDXT SERIES SPEEDGATE ▲

The most robust and adaptable SpeedGate available. From elegant to bullet proof, the infill can be customized to serve the application.

If you have demanding requirements for speed, security and aesthetics, then the PDXT SpeedGate is the perfect choice.

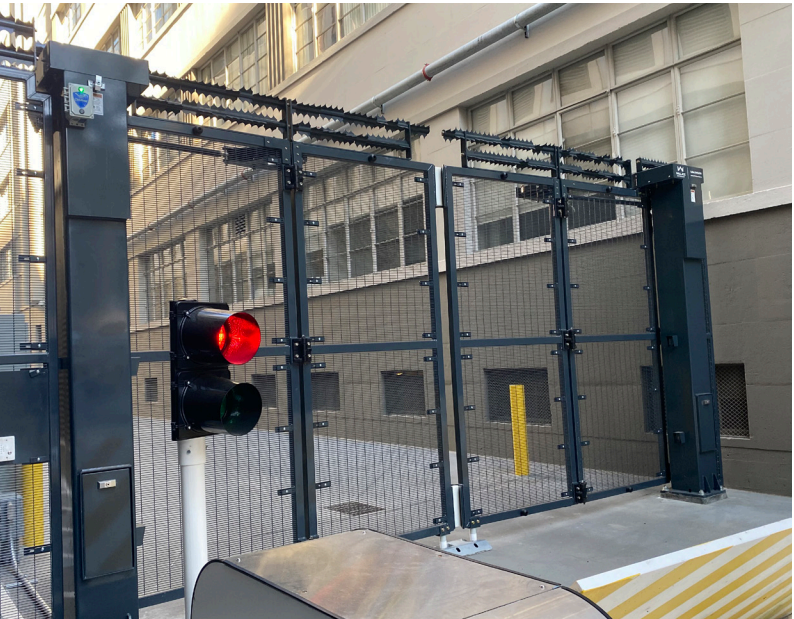

SCAN TO
WATCH
VIDEO





PDTT SERIES SPEEDGATE

The PDTT SpeedGate is designed with security and speed in mind. Installed in North America's most secure facilities, the top track gate has an imposing presence.

The top track on the gate allows for integration of additional security devices such as razor wire, anti-climb hardware and traffic lights. 



CGTT SERIES CORRIDOR SPEEDGATE

The CGTT Corridor SpeedGate provides safe, rapid entry and exit for pedestrians and small equipment. The innovative application of this product does not require the space of a sliding gate, allowing full use of the corridor width. The modular construction of the gate allows for easy integration into existing correctional facilities.




CANTILEVER SLIDING GATES


Cantilever sliding gates are a secure solution for various applications. The absence of a ground track allows the gate to accommodate heavy traffic in continuous duty applications. Ease of operation and maintenance is dramatically improved.

Modular construction allows for quick, economical delivery, and cost-effective future serviceability.


The rack and pinion drive is quiet, and provides a secure entrance while maximizing the gate's lifespan. Sealed bearings in the rollers and nylon polyamide rack and pinion gears eliminate the maintenance requirements of conventional chain drive operators. Straightforward sizing allows for quick shipping.

ALPHA CANTILEVER SLIDING GATE

The Alpha gate combines optimum quality and security. Strong and clever, this smoothly running gate is available with a variety of infill options, including chain-link and welded wire. 

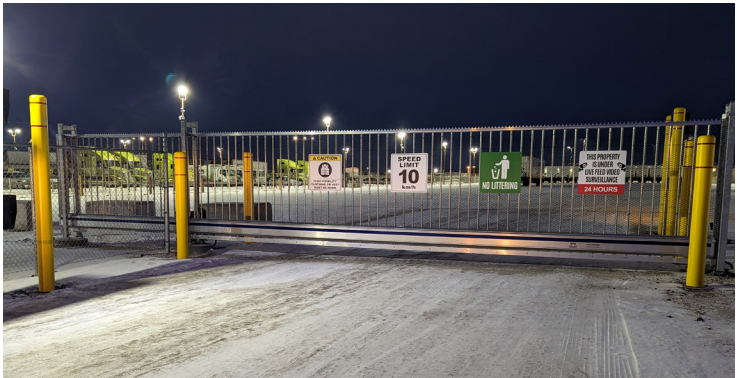


DELTA CANTILEVER SLIDING GATE

The contemporary design of the Delta gate is sturdy and safe with no diagonal braces that intruders could use to climb over. The vertical bar infill is available in a variety of colors complementing the appeal of your property. 



PEDESTRIAN ▶ GATES

Discover the ease, durability and versatility of our pre-hung pedestrian gates. Designed for convenience and efficiency, these gates ship fully assembled, ensuring a hassle-free installation. Customize your gate with different infill types, color finishes, self-closers, and various locking hardware to suit your style and security needs. Integrated access control options provide added security and convenience.

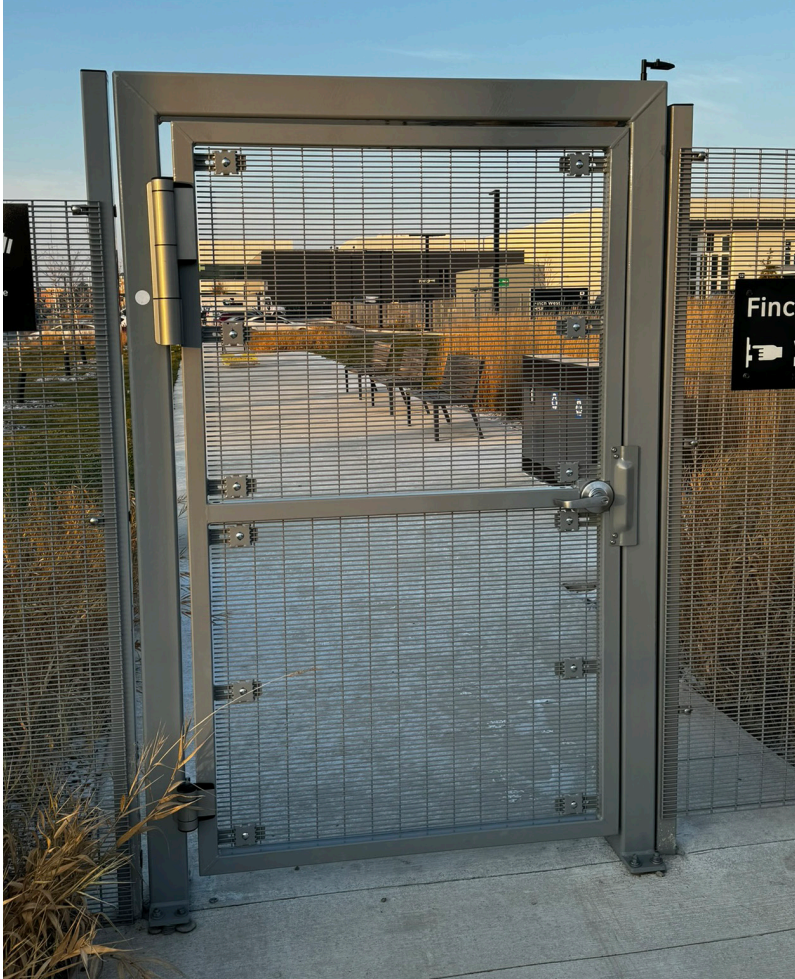

PEDESTALS

A well designed pedestal head and stand plays an important role in the security and access control for automatic gate systems.

These access control pedestals provide a strong mounting solution for keypads, card readers, intercoms, security cameras, and other security and access control entry devices for gates, leaving your location protected at all times.

With removable face plates and tamper proof hardware, our polycarbonate pedestal heads are designed with ease of installation in mind.



The 40" Pedestal Stand is a common choice for pedestrian, car and pad mount handicap (ADIA) compliant specifications.

The 88" Pedestal Stand is made for semi trucks and buses and is available in single or dual head configurations. Stand height can be customized and both large and small polycarbonate heads are available.



**SCAN TO
WATCH
VIDEO**



GATE CONTROL STANDS ▲

Custom control stands are available for the PDXT and PDTT Series SpeedGates, designed to protect some of the most important components of the gate. Vertical and horizontal controller stands are available.

RAMPART WELDED WIRE


When it comes to form and function Rampart Welded Wire has you secured. Cutting through welded mesh is time-consuming and difficult. Rampart Welded Wire adds beauty and elegance to every property it protects.

SECURITY CAN BE ELEGANT

See the difference between welded wire and chain link. Watch as an intruder tries to cut both.



SCAN TO
WATCH
VIDEO

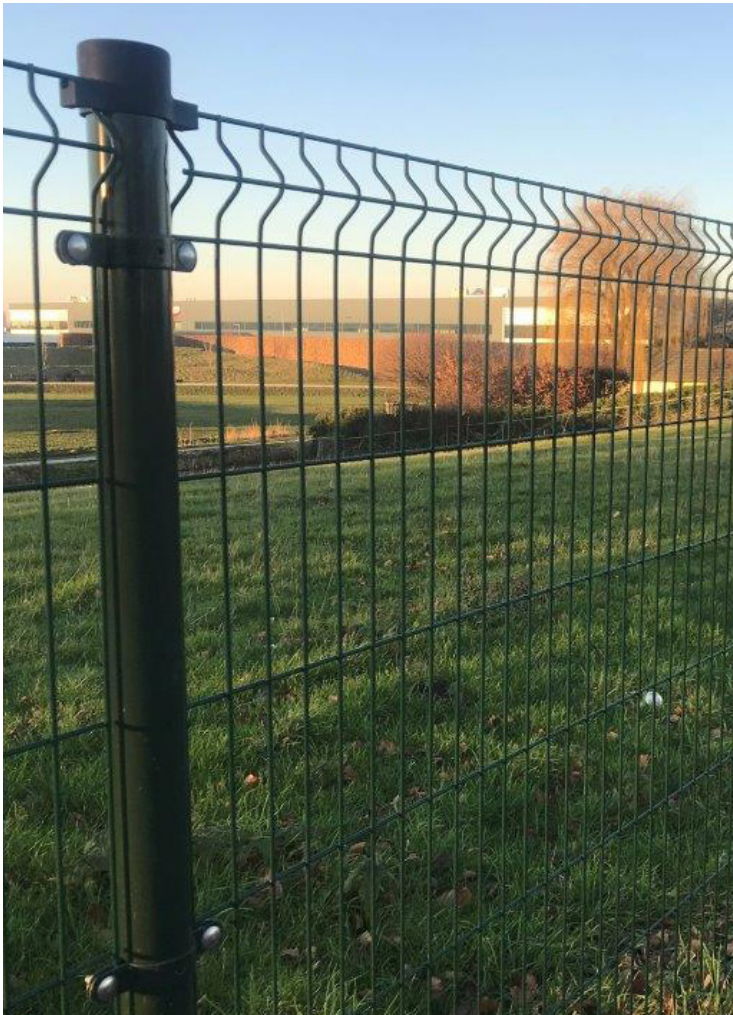

RAMPART 286 SINGLE WIRE ▲

panels are aesthetically attractive and a cost-efficient alternative to traditional ornamental fencing. The special 3D technique ensures that in spite of its limited weight, this profiled panel is still astoundingly stable.



RAMPART 284 DOUBLE WIRE ▲

panels are a great entry-level, double wire fence system and the perfect solution to address the drawbacks associated with chain link fence. The strong and rigid panel offers a stable and cost-effective solution for absolute security.



RAMPART 280 DOUBLE WIRE ▲

panels combine beauty with our strongest double wire panel. The welding of the wire interfaces are intended for intense security use and made to resist the onslaught of even the most motivated trespassers.

RAMPART **WELDED WIRE**

RAMPART 358 SECURITY ▼

panels provide an extraordinary high security solution. The small mesh openings make it nearly impossible to scale and very difficult to cut.



RAMPART 354 SECURITY ▼

panels provide the highest level of security. The small mesh size combined with additional horizontal double wires ensure a strong and rigid panel.



INSERTS ▲

Improve the level of privacy and security with welded wire inserts. The rigid horizontal, polyethylene slats weave into standard welded wire fencing. The attractive appearance and original color will remain intact for years. Sold in pre-cut lengths, the standard colours available are black, gray and transparent.





WELDED WIRE SYSTEMS

Have a vision? Talk to us.

Welded Wire panels are incredibly versatile. Their modular design allows for a wide range of configurations to solve most perimeter security challenges. If you have a unique area you need secured, give us a call and ask us to develop a custom solution.



115 Lowson Crescent
Winnipeg, Manitoba
Canada R3P 1A6
Phone: 866.300.1110
Fax: 204.284.1868

wallaceperimetersecurity.com