

Curva a 87°30'


Bend 87°30'

Coude à 87°30'

Codo 87°30'



01 25 1031 000

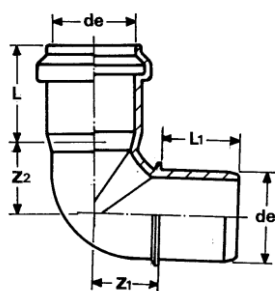

de	L	L1	Z1	Z2	Gr	Quant	Nº Código
32	38	42	17	22	48	200	01 25 1031 032
40	47	44	22	27	76	100	01 25 1031 040
50	54	55	25	35	107	100	01 25 1031 050
75	60	56	45	50	205	60	01 25 1031 075
90	65	57	49	60	295	30	01 25 1031 090
110	68	61	60	72	440	20	01 25 1031 110
125	75	68	68	73	476	15	01 25 1031 125

Curva a 45°


Bend 45°

Coude à 45°

Codo 45°



01 25 1032 000

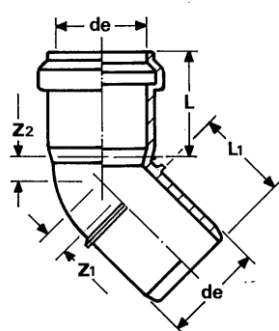

de	L	L1	Z1	Z2	Gr	Quant
32	43	42	7	14	47	200
40	47	44	8	15	63	100
50	49	46	9	16	83	100
75	60	52	18	18	150	80
90	65	57	23	25	230	40
110	71	64	23	30	320	25
125	76	68	30	35	384	20

Nº Código

01 25 1032 032

01 25 1032 040

01 25 1032 050

01 25 1032 075

01 25 1032 090

01 25 1032 110

01 25 1032 125

Tê a 87°30'


Single branch 87°30'

Té à 87°30'

Injerto simples 87°30'



01 25 1033 000

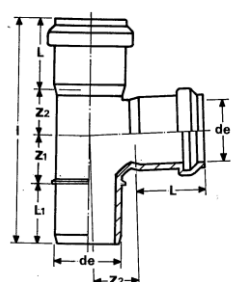

de	I	L	L1	Z1	Z2	Gr	Quant
32	121	41	43	19	18	73	100
40	140	47	44	22	27	110	120
50	166	51	50	25	33	170	80
75	198	57	59	35	48	300	40
90	260	70	68	62	60	430	20
110	277	71	64	72	72	620	13
125	283	75	66	69	73	640	10

Nº Código

01 25 1033 032

01 25 1033 040

01 25 1033 050

01 25 1033 075

01 25 1033 090

01 25 1033 110

01 25 1033 125

Tê de redução a 87°30'


Reducing single branch 87°30'

Culotte de réduction à 87°30'

Injerto simples 87°30'



01 25 1084 000

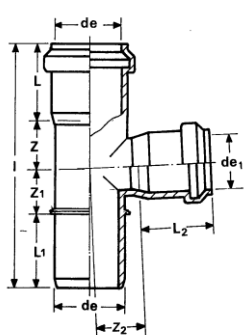

de	de1	I	L	L1	L2	Z	Z1	Z2	Gr	Quant
90	40	206	71	72	50	37	25	56	308	35
90	50	206	71	72	54	37	25	56	310	30
110	90	266	71	74	71	61	60	75	550	15

Nº Código

01 25 1084 010

01 25 1084 011

01 25 1084 015

Forquilha a 45°


Fork 45°

Culotte 45°

Injerto simples 45°



01 25 1083 000

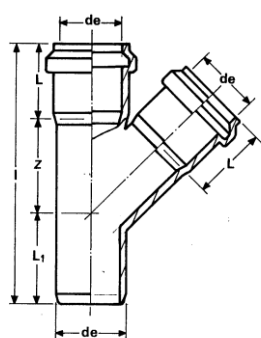

de	I	L	L ₁	Z	Gr	Quant
32	130	43	50	37	82	100
40	162	49	54	59	140	80
50	184	53	58	73	186	60
75	229	58	63	108	336	30
90	277	70	77	130	490	18
110	301	70	70	161	652	12
125	318	73	94	151	844	8

Nº Código

01 25 1083 032

01 25 1083 040

01 25 1083 050

01 25 1083 075

01 25 1083 090

01 25 1083 110

01 25 1083 125

Forquilha de redução a 45°


Reducing fork 45°

Culottes de réduction à 45°

Injertos simples 45°



01 25 1196 000

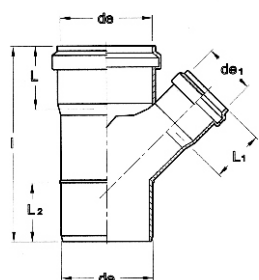

de	de1	L	L1	L2	I	Gr	Quant
75	50	56	50	52	184	240	50
90	50	63	52	58	194	290	20
110	50	61	43	65	200	428	25
110	75	68	57	60	262	536	18
110	90	68	63	60	262	570	15
125	75	73	58	94	318	685	12
125	90	73	64	94	318	722	10
125	110	73	67	94	318	775	10

Nº Código

01 25 1196 009

01 25 1196 011

01 25 1196 013

01 25 1196 014

01 25 1196 015

01 25 1196 019

01 25 1196 020

01 25 1196 021

União de redução


Reducing pipe

Réduction extérieure décentrée

Reducción excentrica



01 25 1036 000

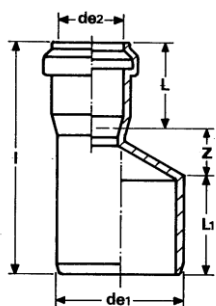

de1	de2	I	L	L1	Z	Gr	Quant
40	32	61	42	31	–	35	400
50	32	104	42	46	16	60	120
50	40	116	50	53	13	76	100
75	40	135	53	53	29	120	120
75	50	99	43	53	3	116	150
90	50	157	54	71	32	160	75
90	75	131	54	58	19	187	80
110	75	151	52	65	34	246	50
110	90	145	63	61	21	200	50

Nº Código

01 25 1036 003

01 25 1036 004

01 25 1036 005

01 25 1036 008

01 25 1036 009

01 25 1036 011

01 25 1036 012

01 25 1036 014

01 25 1036 015

Redução centrada


Reducing

Manchon réduit

Reducción



01 25 1180 000

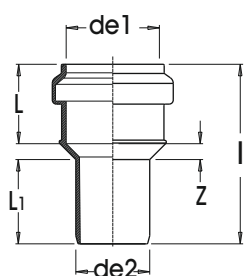

de1	de2	I	L	L1	Z	Gr	Quant
40	32	78	35	37	6	44	250
50	40	83	37	39	7	56	150

Nº Código

01 25 1180 003

01 25 1180 005

Curva de redução a 87°30'


Reducing elbow 87°30'

Coude à 87°30' de réduction

Codo 87°30' reducción



01 25 1031 000

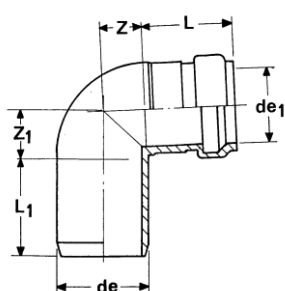

de	de1	L	L1	Z	Z1	Gr	Quant
40	32	39	43	15	20	54	200

Nº Código

01 25 1031 005

União telescópica


Double socketed sleeve

Manchon coulissant

Manguito de reparación



01 25 1185 000

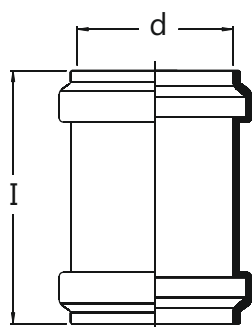

d	I	Gr	Quant
32	86	35	C 160
40	90	60	C 100
50	88	96	C 72
75	106	154	C 80
90	127	225	D 50
110	125	300	D 30
125	133	300	D 24

Nº Código

01 25 1185 032

01 25 1185 040

01 25 1185 050

01 25 1185 075

01 25 1185 090

01 25 1185 110

01 25 1185 125

União simples


Socket

Manchon

Manguito union



01 25 1005 000

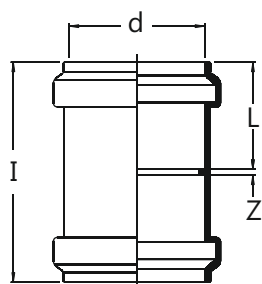

d	I	L	Z	Gr	Quant
32	86	41	4	49	C 160
40	90	43	4	66	C 100
50	88	42	4	100	C 72
75	106	51	4	157	C 80
90	127	62	3	235	D 50
110	125	61	3	310	D 30
125	133	65	3	310	D 24

NEW

Nº Código

01 25 1005 032

01 25 1005 040

01 25 1005 050

01 25 1005 075

01 25 1005 090

01 25 1005 110

01 25 1005 125

Sifão de pavimento ø90


Syphon ø90

Siphon ø90

Bote sifonico ø90



01 25 1070 000

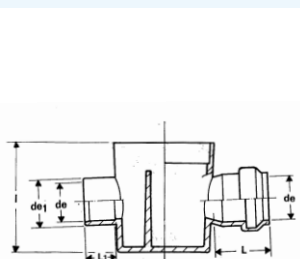

de	de1	I	L	L1	Gr	Quant
40	50	80	46	26	200	60

Nº Código

01 25 1070 005

Sifão de pavimento ø110


Syphon ø110

Siphon ø110

Bote sifonico ø110



01 25 1070 000

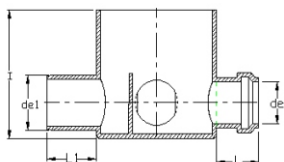

de	de1	I	L	L1	Gr	Quant
40	50	80	42	47	237	30
40	50	115	42	47	280	24

Nº Código

01 25 1070 010

01 25 1070 011

Caixa de sifonagem ø125 fundo curto


Syphon ø125 short bottom

Siphon ø125 fond court

Bote sifonico ø125 fondo corto



01 25 1236 000

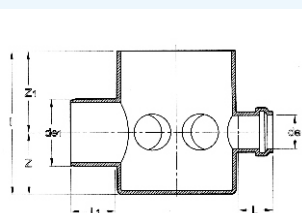

de	de1	L	L1	Z	Z1	I	Gr	Quant
40	50	36	45	69	51	120	580	15
40	75	36	50	69	51	120	577	15

Nº Código

01 25 1236 003

01 25 1236 006

Caixa de sifonagem ø125 fundo longo


Syphon ø125 long bottom

Siphon ø125 fond long

Bote sifonico ø125 fondo largo



01 25 1237 000

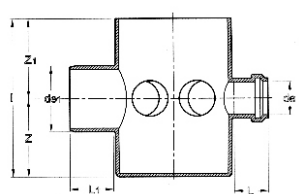

de	de1	L	L1	Z	Z1	I	Gr	Quant
40	75	36	50	89	71	160	664	12

Nº Código

01 25 1237 007

Tampão macho

Plug

Bouchon mâle


Tapon macho



01 25 1011 000

Nº Código

01 25 1011 040

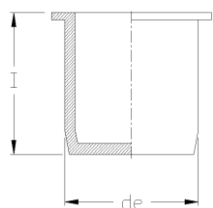


de	I	Gr	Quant
40	35	15	C 400

Lâmina para caixa de sifonagem

Syphon blade

Lame pour siphon

Lámina para bote sifónico

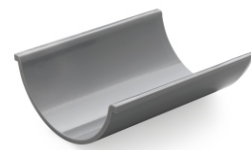

01 25 1238 000

D

125

QUANT

C 250

Nº Código

01 25 1238 125

Curva de sifonagem


Syphonage bend

Coude de siphonnage

Codo de sifonaje



01 25 1239 000

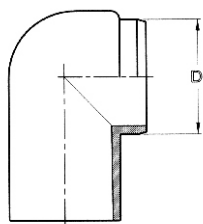

D

40

QUANT

C 140

Nº Código

01 25 1239 040

Aro roscado para sifão

 
Thread ring for syphon

Bague filetée pour siphon

Aro roscado para bote sifonico



01 25 1072 000



G	D	I	Gr	Quant
79x3.18	90	14	40	C 180
100x3.18	110	21	57	C 100
119x3.5	125	28	67	C 60

Nº Código

01 25 1072 005

01 25 1072 010

01 25 1072 015

Aro roscado para tubo

 
Thread ring for pipe

Bague filetée pour tube

Aro roscado para tubo



01 25 1280 000



G	D	I	Gr	Quant
79x3.18	90	17	32	C 180
100x3.18	110	21	43	C 100

Nº Código

01 25 1280 090

01 25 1280 110

Curva de sanita


WC outlet elbow

Coude pour sortie de WC

Codo salida de WC



01 25 1076 000

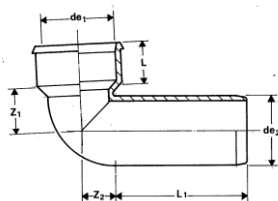

de1	de2	L	L1	Z1	Z2	Gr	Quant
110	90	56	173	55	58	400	20

Nº Código

01 25 1076 090

Canhão de sanita


WC outlet

Manchette

Salida de WC



01 25 1082 000

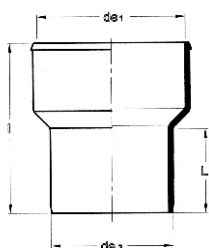

de1	de2	I	L	Gr	Quant
110	90	126	63	126	60

Nº Código

01 25 1082 090

Tampa roscada cromada - ABS

Screw cap - ABS

Couvercle fileté - ABS

Tapa roscada cromada - ABS



*40 25 4203 000

Ø

125

Nº Código

40 25 4203 125

Tampa roscada - INOX

Screw cap - INOX

Couvercle fileté - INOX

Tapa roscada - INOX



* 40 25 9203 000

Ø	QUANT
90	80
110	50
125	40

Nº Código
40 25 9203 090
40 25 9203 110
40 25 9203 125

Tampa ajustável para sifão

Syphon adjustable cap

Couvercle réglable pour siphon

Tapa ajustable para bote sifonico



* 40 25 2265 000

Ø

110

125

Nº Código

40 25 2265 110

40 25 2265 125

Aro - INOX

Ring - INOX

Bague - INOX

Aro - INOX



*40 25 9228 000

Ø

90

110

125

Nº Código

40 25 9228 090

40 25 9228 110

40 25 9228 125