



## INSIDE MOUNT WINDOW MEASURING GUIDE

Measuring is the first step of your PowerShades journey! Here are some quick tips on how to successfully measure your window. We recommend measuring down to a 1/16 of an inch for precise fitting. If you ever need any help throughout, reach out to us at (417) 553-0504.

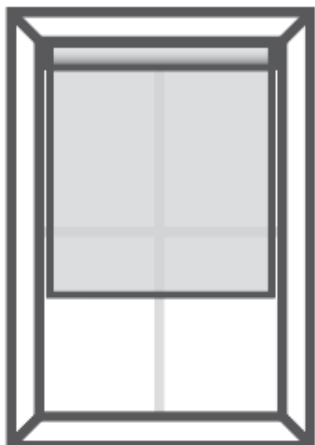

### WIDTH


Measure the width of the window by gathering measurements at center depth at the top of the window jamb from left edge to right edge inside the window jamb.

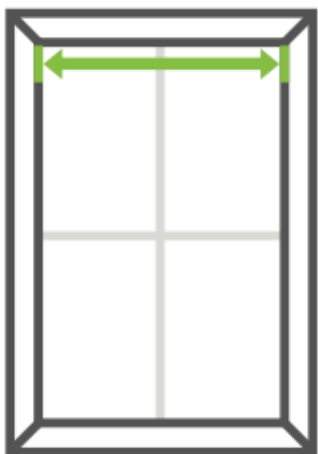

It is encouraged to take 1/8 of an inch off the total width for an ensured fit inside the window jamb.

## HEIGHT

Measure the height of the window from the top inside jamb vertically to the bottom inside jamb while measuring down the center.

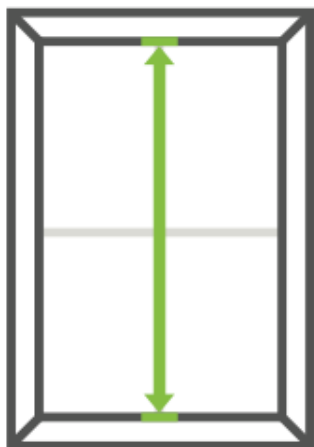

## DEPTH

Measure the inside top jamb on the left and right side from the back of the jamb to the surface. Take the shortest of the two measurements.

