



DecoFrame Kits

DecoFrame Kit Canopies are available in several different shapes, sizes, as well as a range of profiles, transitions and accessories. They are compatible with Zentia's suspended ceiling tiles and grids, including all products in the DecoMesh range.



DecoFrame

Aesthetic Appeal Meets Acoustic Performance

Zentia's DecoFrame canopies are designed to deliver on both style and practicality, providing a modern, striking visual appearance while maintaining excellent acoustic performance. Packaged and delivered as a kit, the canopies offer quick and easy installation. With DecoFrame, there's no need to compromise between aesthetics and functionality.

This makes DecoFrame canopies the perfect solution for open-plan environments such as offices, schools, and public buildings, where controlling acoustics and maintaining an appealing design are critical.

The DecoFrame range offers a variety of standout features designed to enhance both aesthetics and functionality. Its floating canopy design adds dimension and visual appeal to any space, available in customisable shapes like circle, curved, and rectangular forms. The frame and tile system is compatible with a wide range of ceiling tiles, offering design flexibility for all shapes, while the acoustic performance makes it an ideal choice for open-plan areas like offices and schools. Installation is simple and efficient thanks to the joggled Gridline system, allowing for quick, hassle-free setup.

Built from durable materials, DecoFrame ensures long-lasting performance with minimal maintenance. The canopies are fully compatible with DecoMesh, a range of metal mesh ceiling tiles, offering designers the option to incorporate expanded metal mesh

materials for added texture and visual interest. The DecoFrame also pairs perfectly with the Prestige range, a balanced acoustical tile that comes in a wide range of colours.

The DecoFrame's modular construction allows easy expansion or modification, making it adaptable to evolving project needs, providing a versatile and functional solution for modern spaces.



Installation Video



Contact Us



Find us on NBS

Key features and benefits of the DecoFrame include:

- // **Seamless Integration:** DecoFrame canopies integrate effortlessly with nearly all of Zentia's range of ceiling tiles, providing designers with creative flexibility.
- // **Optimised Acoustics:** Each canopy enhances sound control, making it ideal for open-plan spaces such as offices, schools, and public buildings.
- // **Customisable Design:** Available in various shapes, including circle, curved, and rectangular, DecoFrame is customisable to meet the unique needs of any project.



DecoFrame Kit Classic Canopy

Floating ceiling suspension kits using 112mm Gridline Aluminium Profile frame to create ceiling canopies.


Key Features

- ✓ Made-to-measure components and accessories all in a single box, ready-to-install for quick and easy installation
- ✓ Available in 10 standard modules with Gridline 15 or 24 for installation with full size ceiling tiles. Custom dimensions available on request
- ✓ Pre-fabricated corner sections for high quality corner detailing
- ✓ Ideal for reception areas, meeting areas circulation spaces and retail



Suspension System	DecoFrame Kit Classic Canopy – Gridline 15 Joggled	DecoFrame Kit Classic Canopy – Gridline 24 Joggled
Modules (mm)	1200 x 1200 AX 22 G15A 1800 x 1200 AX 32 G15A 1800 x 1800 AX 33 G15A 2400 x 1200 AX 42 G15A 2400 x 1800 AX 43 G15A 2400 x 2400 AX 44 G15A 3000 x 1200 AX 52 G15A 3000 x 1800 AX 53 G15A 3000 x 2400 AX 54 G15A 3000 x 3000 AX 55 G15A	1200 x 1200 AX 22 G24A 1800 x 1200 AX 32 G24A 1800 x 1800 AX 33 G24A 2400 x 1200 AX 42 G24A 2400 x 1800 AX 43 G24A 2400 x 2400 AX 44 G24A 3000 x 1200 AX 52 G24A 3000 x 1800 AX 53 G24A 3000 x 2400 AX 54 G24A 3000 x 3000 AX 55 G24A
System Width	15mm	24mm
Tile Compatibility	Tegular15	Board / Tegular24 / Integra
Sustainability	 E1 EN 13964	
Fire Reaction¹	 Euroclass A2-s1, d0 EN 13501-1 ¹For the Canopy kit	
Performances & Features	   30 Year System Guarantee Other performances values will depend upon the infill tile used with the DecoFrame Kit Classic Canopy	
Custom Options	 Dimensions  Shapes	

Installation Layout

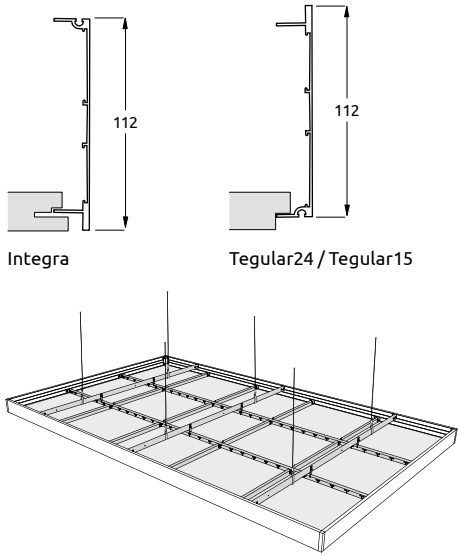

	3000	2400	1800	1200
1200				
1800				
2400				
3000				

Ceiling tiles are NOT included in this kit

DecoFrame Kit Classic Canopy SL2 Planks

Floating ceiling suspension kits using curved 112mm Gridline Aluminium Profile to create semi-concealed ceiling canopies.

Key Features


- ✓ Made-to-measure components and accessories all in a single box, ready-to-install for quick and easy installation
- ✓ Available in 6 standard modules with Z-Bars for installation with full size SL2 ceiling planks. Custom dimensions available on request
- ✓ Pre-fabricated corner sections for high quality corner detailing
- ✓ Ideal for reception areas, meeting areas circulation spaces and retail




Suspension System	DecoFrame Kit Classic Canopy SL2			
Modules (mm)	1800 x 1500.....	AX 36G SL2A		
	2400 x 1500.....	AX 46G SL2A		
	3000 x 1500.....	AX 56G SL2A		
	1800 x 1800.....	AX 33G SL2A		
	2400 x 1800.....	AX 43G SL2A		
	3000 x 1800.....	AX 53G SL2A		
Tile Compatibility	SL2			
Sustainability		E1 EN 13964		
Fire Reaction ¹		Euroclass A2-s1, d0 EN 13501-1		¹ For the Canopy kit
Performances & Features				30 Year System Guarantee Other performances values will depend upon the infill tile used with the DecoFrame Kit Classic Canopy SL2
Custom Options	 Dimensions	 Shapes		

Installation Layout

Gridline Aluminium Profile
Integra / Tegular24
55 14 11 G

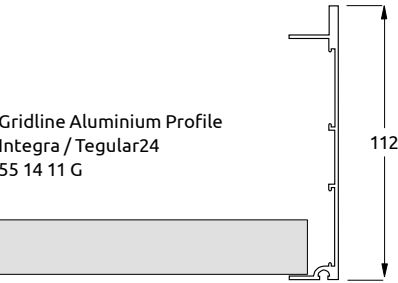

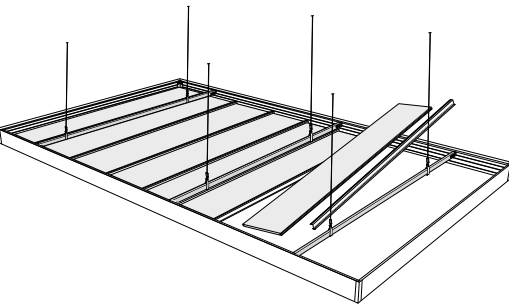

1800

1500

6 planks

1800

8 planks

2400

10 planks

3000

Ceiling tiles are NOT included in this kit

DecoFrame Kit Blade Canopy

Floating ceiling suspension kits with Gridline Aluminium DecoFrame. Blade Profile for ceiling canopies with a sleek, minimalist appearance.

Key Features

- ⚡ Made-to-measure components and accessories all in a single box, ready-to-install for quick and easy installation
- ⚡ Available in 10 standard modules with Gridline 15 or 24 for installation with full size ceiling tiles. Custom dimensions available on request
- ⚡ Pre-fabricated corner sections for high quality corner detailing
- ⚡ Ideal for reception areas, meeting areas circulation spaces and retail



Suspension System	DecoFrame Kit Blade Canopy – Gridline 15 Joggled	DecoFrame Kit Blade Canopy – Gridline 24 Joggled
Modules (mm)	1200 x 1200 AK 22 G15A 1800 x 1200 AK 32 G15A 1800 x 1800 AK 33 G15A 2400 x 1200 AK 42 G15A 2400 x 1800 AK 43 G15A 2400 x 2400 AK 44 G15A 3000 x 1200 AK 52 G15A 3000 x 1800 AK 53 G15A 3000 x 2400 AK 54 G15A 3000 x 3000 AK 55 G15A	1200 x 1200 AK 22 G24A 1800 x 1200 AK 32 G24A 1800 x 1800 AK 33 G24A 2400 x 1200 AK 42 G24A 2400 x 1800 AK 43 G24A 2400 x 2400 AK 44 G24A 3000 x 1200 AK 52 G24A 3000 x 1800 AK 53 G24A 3000 x 2400 AK 54 G24A 3000 x 3000 AK 55 G24A
System Width	15mm	24mm
Tile Compatibility	Tegular15	Board / Tegular24 / Integra

Sustainability

E1
EN 13964

Fire Reaction¹

Euroclass A2-s1, d0
EN 13501-1

¹For the Canopy kit

Performances & Features




Other performances values will depend upon the infill tile used with the DecoFrame Kit Blade Canopy

Custom Options


DimensionsShapes


Installation Layout

Integra

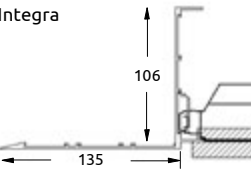

Tegular24

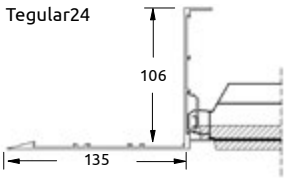

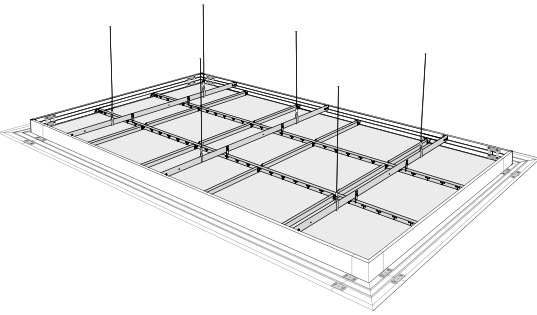

	3000	2400	1800	1200
1200	10 tiles	8 tiles	6 tiles	4 tiles
1800	15 tiles	12 tiles	9 tiles	
2400	20 tiles	16 tiles		
3000	25 tiles			

Ceiling tiles are NOT included in this kit

DecoFrame Kit Circle & Curved Canopy

Floating ceiling suspension kits using curved 100mm Gridline Aluminium Profile to create attractive rounded ceiling canopies.



Key Features

- /// Made-to-measure components and accessories all in a single box, ready-to-install for quick and easy installation
- /// Available in 7 standard shapes/modules with Gridline 15 or 24. Custom dimensions available on request
- /// Pre-curved sections for high quality finish – no cutting
- /// Ideal for reception areas, meeting areas circulation spaces and retail




Suspension System	DecoFrame Kit Circle & Curved – Gridline 15 Joggled	DecoFrame Kit Circle & Curved – Gridline 24 Joggled	
Modules (mm)	Circle Ø1800 CS ACI 33 G15A Circle Ø2400 CS ACI 44 G15A Curved 2400 x 1800 CS ACU 43 G15A Curved 2400 x 2400 CS ACU 44 G15A Curved 3000 x 1800 CS ACU 53 G15A Curved 3000 x 2400 CS ACU 54 G15A Curved 3000 x 3000 CS ACU 55 G15A	Circle Ø1800 CS ACI 33 G24A Circle Ø2400 CS ACI 44 G24A Curved 2400 x 1800 CS ACU 43 G24A Curved 2400 x 2400 CS ACU 44 G24A Curved 3000 x 1800 CS ACU 53 G24A Curved 3000 x 2400 CS ACU 54 G24A Curved 3000 x 3000 CS ACU 55 G24A	
System Width	15mm	24mm	
Tile Compatibility	Tegular15	Tegular24	
Sustainability	 E1 EN 13964		
Fire Reaction ¹	 Euroclass A2-s1, d0 EN 13501-1		¹ For the Canopy kit
Performances & Features	    Other performances values will depend upon the infill tile used with the DecoFrame Kit Circle & Curved Canopy		
Custom Options	 Dimensions  Shapes  Service Integration		


Installation Layout

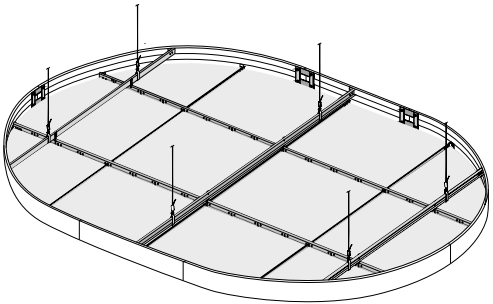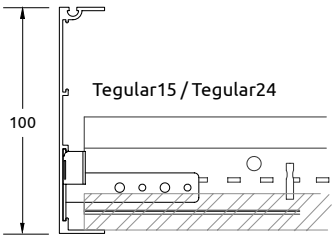

DecoFrame Kit Curved Canopies

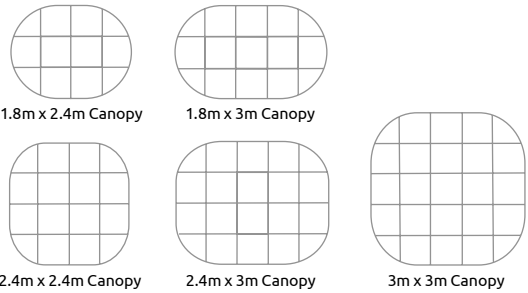

DecoFrame Kit Circle Canopies

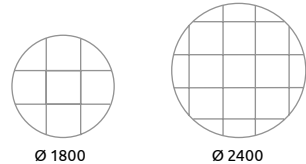

Ceiling tiles are **NOT** included in this kit

Gridline Aluminium Transitions

Extruded aluminium sections to provide a seamless transition between plasterboard margins and suspended ceilings.

Key Features


- Designed for compatibility with different edge details using Gridline universal accessories for secure and easy installation
- Compatible with Zentia exposed ceiling grid systems including Silhouette and Interlude designer grids
- Plasterboard jointing flange for seamless integraton with plasterboard ceilings

Application Areas: perimeters






Physical Data

- Material: aluminium
- Surface finish: polyester powder painted
- Colour: Global White


Product Range

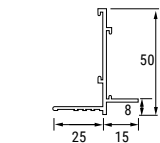


Item No.	Description	Dimensions (mm)		Standard Colours
		Length	Height	
T 3208 H	Axiom Transitions for Tegular24/Tegular15	3000	50	•
T 3219 H	Gridline Aluminium Transitions shadowline channel	3000	50	•
T 3215 H	Gridline Aluminium Transitions shadowline angle	3000	50	•
T 3210 H	Gridline Aluminium Transitions for Integra tiles	3000	50	•
T 3230 A	Gridline Aluminium Transitions upstand channel 13mm board	3000	53	•
T 3271 A	Gridline Aluminium Transitions angle	3000	51	•

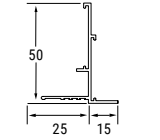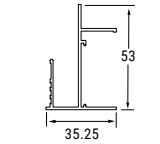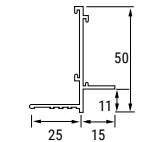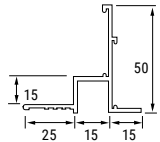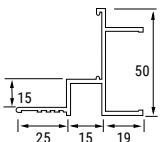

System Drawing

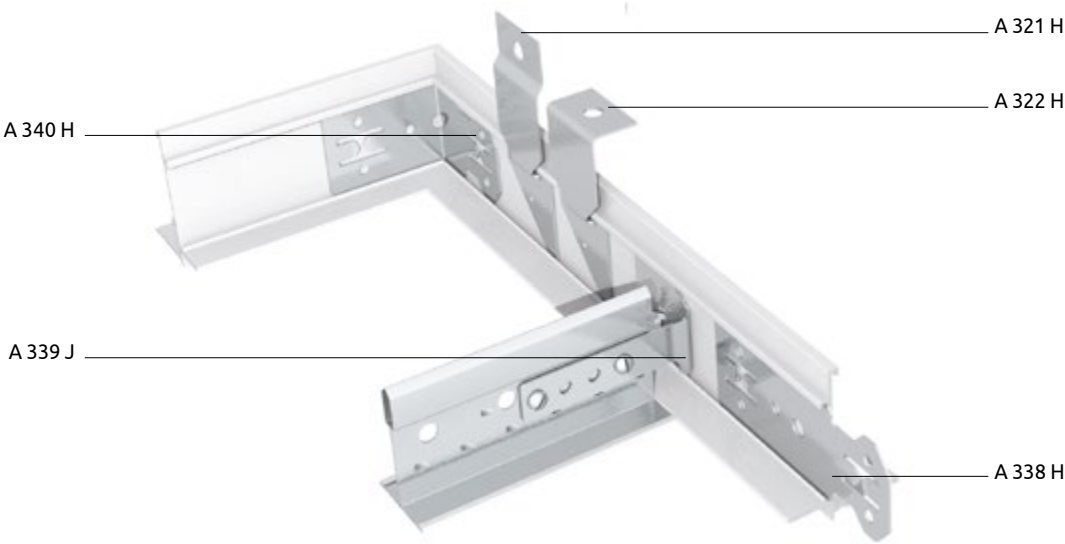

Cross Section

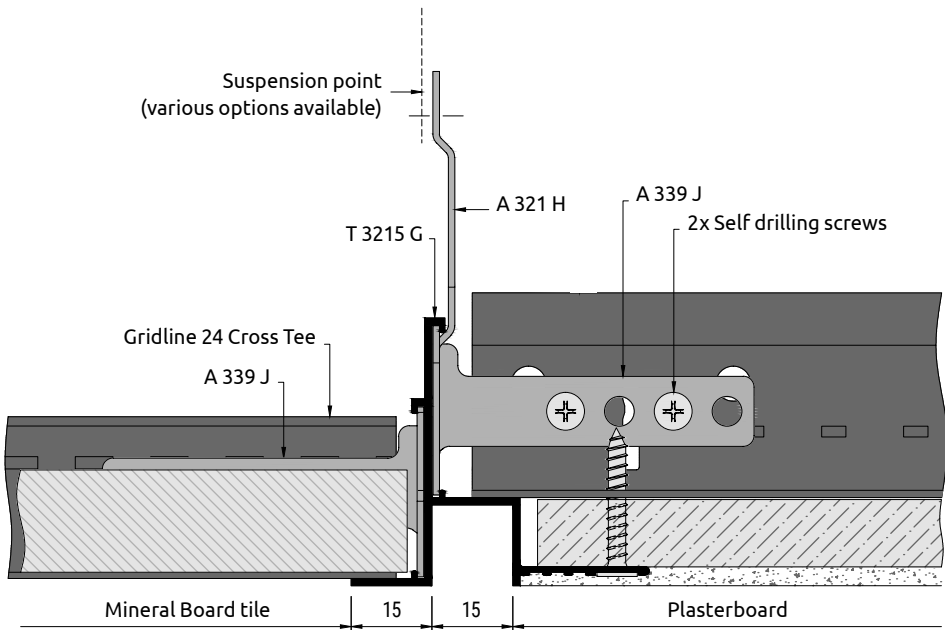

Sustainability



A+



EN 13964
E1

Fire Reaction



Euroclass A2-s1, d0
EN 13501-1

Other Performances & Features



30 Year
System
Guarantee

Gridline Aluminium Perimeter Angles/Channels

Extruded aluminium sections for classic perimeter solutions with ceilings.


Key Features

- Angle and channel sections designed for compatibility with Gridline accessories for secure and easy installation
- Compatible with ceiling grid systems including Silhouette designer grids
- Application Areas: perimeters





Physical Data

- Material: aluminium
- Surface finish: polyester powder painted
- Colour: Global White

Product Range

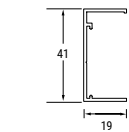






Item No.	Description	Dimensions (mm)		Standard Colours
		Length	Height	Global White
T 3249 A	Gridline Aluminium Perimeter C profile 41 x 19mm	3000	41	•
T 3227 A	Gridline Aluminium Perimeter Shadowline channel 35 x 15 x 15 x 15mm	3000	50	•
T 3248 A	Gridline Aluminium Perimeter Shadowline channel 35 x 15 x 6.5 x 15mm	3000	40	•
T 3235 A	Gridline Aluminium Perimeter angle 35 x 15mm	3000	35	•
T 3225 H	Gridline Aluminium Perimeter plasterboard trim 50 x 40mm	3000	50	•

 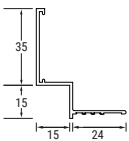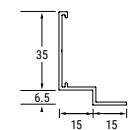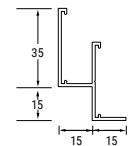

Accessories




Item No.	Description	Dimensions (mm)	
		Height	
A 340 J	Gridline Aluminium Universal corner clip	-	
A 338 J	Gridline Aluminium Universal spice plate	-	
A 339 K	Gridline Aluminium Universal T bar connector clip	-	
A 344 J	Gridline Aluminium Universal hanging clip	-	
A 321 J	Gridline Aluminium Transitions suspension clip – straight	79	
A 322 J	Gridline Aluminium Transitions suspension clip – angled	62	

     


Cross Sections

Connector Clip

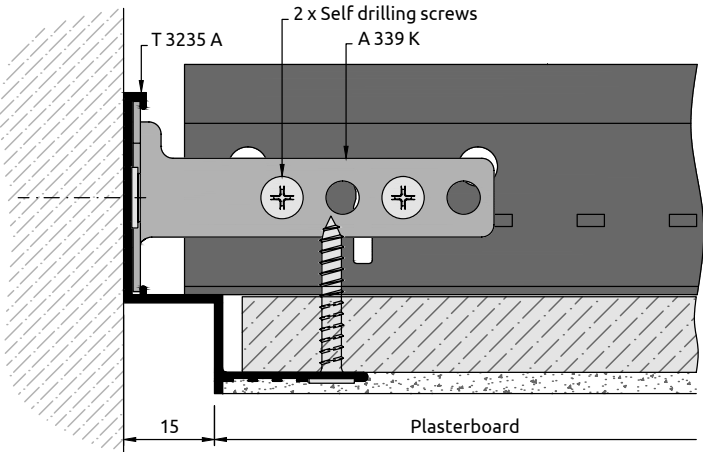

Board to Wall

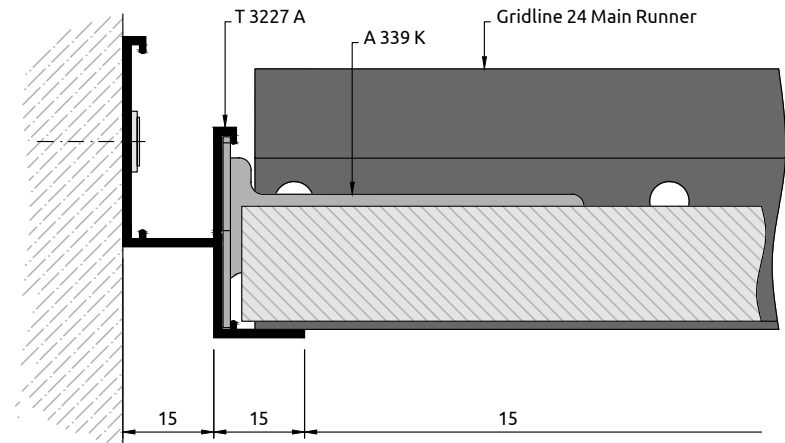

Sustainability



A+



EN 13964
E1

Fire Reaction



EEA Euroclass A2-s1, d0
EN 13501-1

Performances & Features



30 Year
System
Guarantee

Custom Options



Dimensions




Gridline Aluminium Profiles

Extruded aluminium sections for classic perimeter detailing, changes of level and lighting features.

Key Features


- // Available in 5 different heights with Gridline Aluminium Profiles corner posts and universal accessories for secure and easy installation
- // Compatible with Zentia exposed ceilings grid systems including Sihouette designer grids
- // Plasterboard trims for seamless integration with plasterboard ceilings
- // Factory finished, no on-site decoration required – save time on plastering, sanding and painting
- // Ideal for perimeters, changes in level, lighting features
- // Material: aluminium
- // Surface finish: polyester powder painted
- // Colour: Global White

Product Range

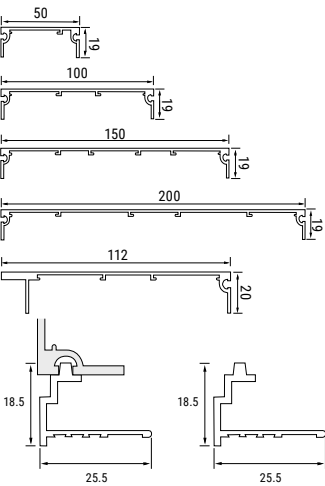


Item No.	Description	Dimensions (mm)		Standard Colours
		Length	Height	Global White
52 42 06 H	Gridline Aluminium Profiles 50mm	3000	50	•
54 42 06 H	Gridline Aluminium Profiles 100mm	3000	100	•
56 42 06 H	Gridline Aluminium Profiles 150mm	3000	150	•
58 42 06 H	Gridline Aluminium Profiles 200mm	3000	200	•
55 14 11 G	Gridline Integra Profiles 112mm	3000	112	•
T 3213 H	Gridline Aluminium Profiles plasterboard trim	3000	18.5	•

Accessories

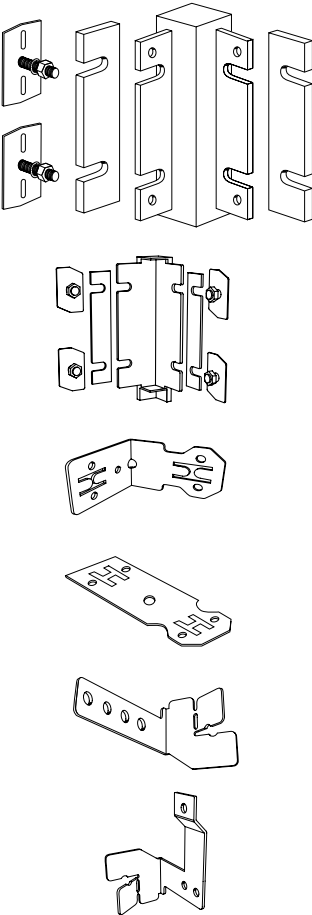


Item No.	Description	Standard Colours
		Global White
A 334 H	Gridline Aluminium Profiles corner post 50mm	•
A 335 H	Gridline Aluminium Profiles corner post 100mm	•
A 336 H	Gridline Aluminium Profiles corner post 150mm	•
A 337 H	Gridline Aluminium Profiles corner post 200mm	•
A 345 H	Gridline Aluminium Profiles Integra corner post 112mm	•
A 340 J	Universal corner clip	
A 338 J	Universal splice plate	
A 339 K	Universal T bar connector clip	
A 344 J	Universal hanging clip	

System Drawing

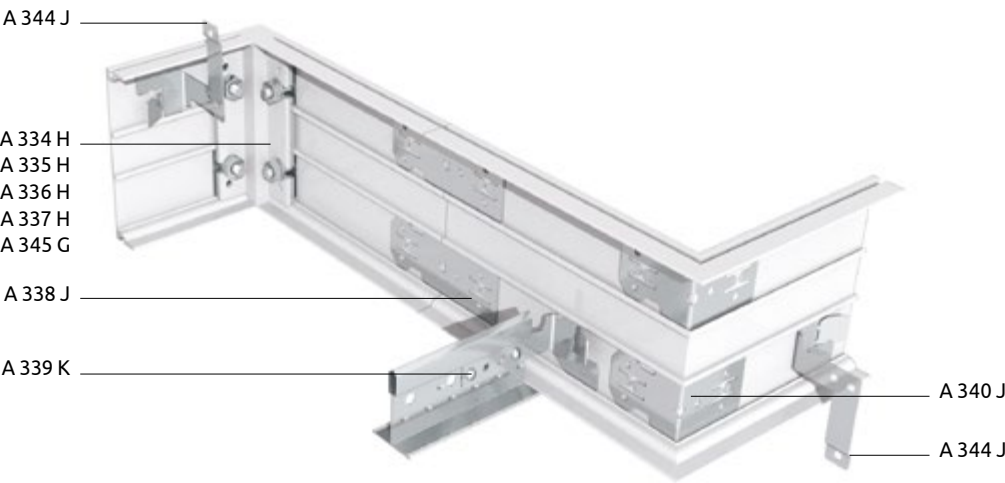

Concealed Lighting Detail Cross Section

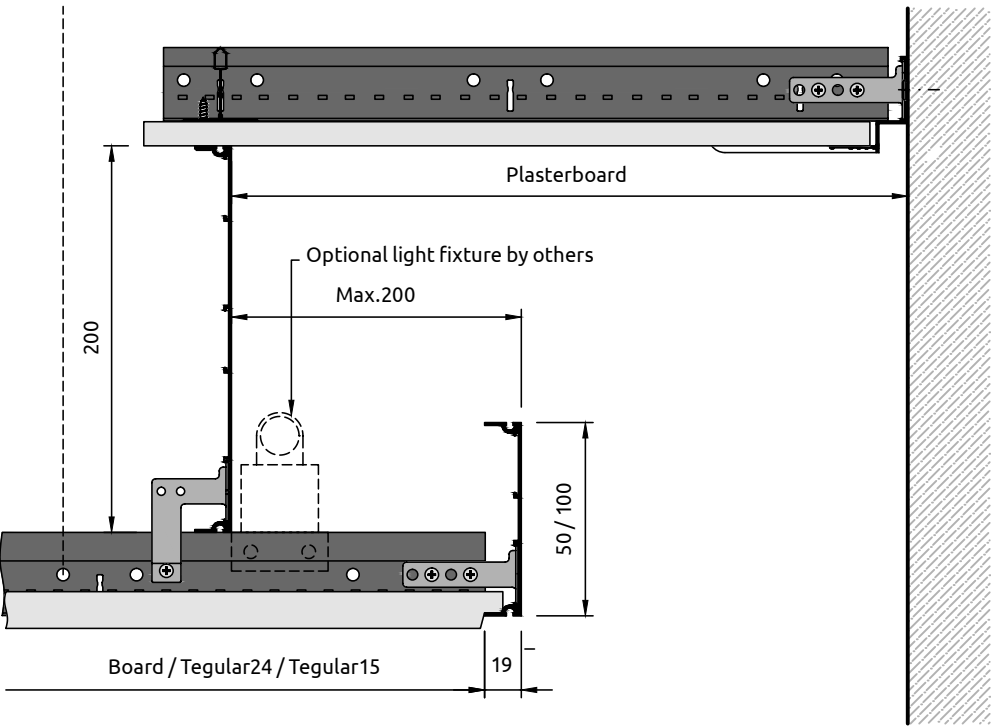

Fire Reaction



Euroclass A2-s1, d0
EN 13501-1


Performances & Features




Gridline Aluminium Blind Boxes

Extruded aluminium profiles for detailing perimeter blind boxes or concealed lighting features.

Product Range

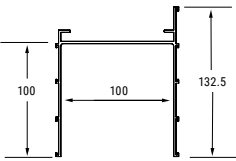





Item No.	Description	Dimensions (mm)		Standard Colours
		Length	Height	
T 3250 A	Gridline Aluminium Blind Box 100mm	3000	132.5	•

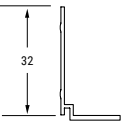

T 3251 A	Gridline Aluminium Blind Box Perimeter angle	3000	32	•
----------	--	------	----	---

Accessories

Item No.	Description	Dimensions (mm)	
		Height	
A 340 J	Universal corner clip	-	
A 338 J	Universal splice plate	-	
A 344 J	Universal hanging clip	-	
A 3255 A	Hanger for Gridline Aluminium Blind Box	25	

    

Key Features


- Pre-engineered profiles using Gridline universal accessories for a secure and easy installation
- Provide a sharp finish to integrate with suspended ceiling tiles or plasterboard ceilings
- Factory finished, no on-site decoration required – save time on plastering, sanding and painting
- Ideal for perimeters, lighting features

Physical Data


- Material: aluminium
- Surface finish: polyester powder painted
- Colour: Global White

Cross Sections

Cross Section Tegular15 / Tegular24

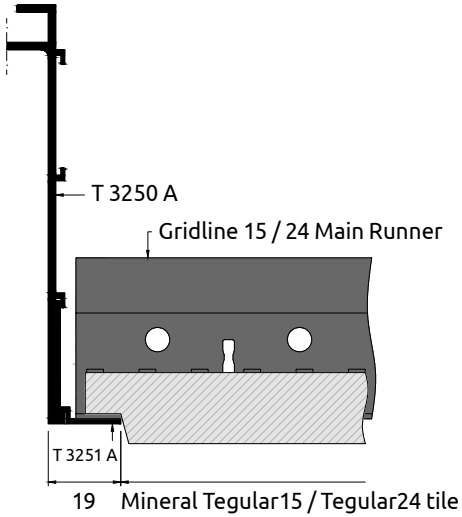

Gridline Aluminium Blind Box to Wall

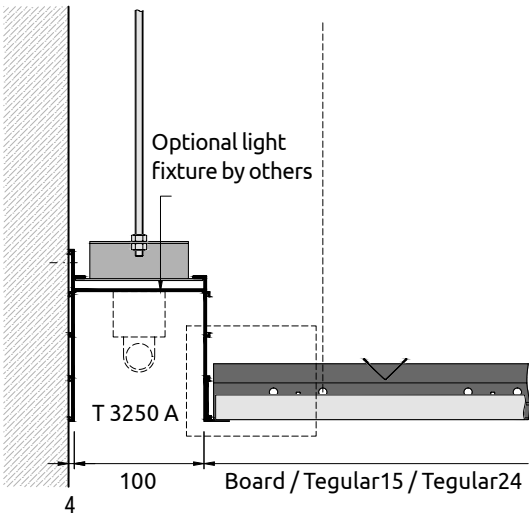

Sustainability



EN 13964
E1

Fire Reaction



Euroclass A2-s1, d0
EN 13501-1

Performances & Features




30 Year
System
Guarantee


The Gridline Aluminium Range

Perimeter Trims • Transitions • Profiles • Blind Boxes


Gridline Aluminium Perimeter Trims

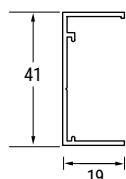


T 3249 H
Gridline Aluminium
Perimeter Trims
C Profile

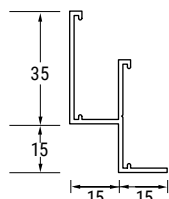


T 3227 A
Gridline Aluminium
Perimeter Trims
shadowline angle

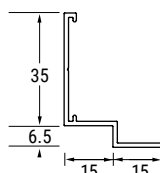

 T 3248 A
Gridline Aluminium
Perimeter Trims
shadowline angle




T 3235 A
Gridline Aluminium
Perimeter Trims
Perimeter angle

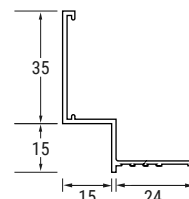


T 3225 H
Gridline Aluminium
Perimeter plaster-
board trim


Gridline Aluminium Transitions

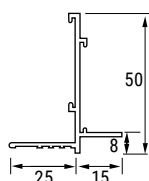


T 3208 H
Gridline Aluminium
Transitions
Tegular24/15

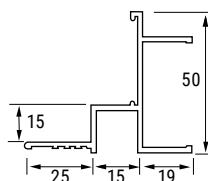


T 3219 H
Gridline Aluminium
Transitions
shadowline channel

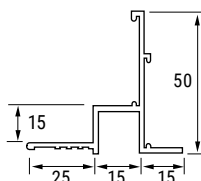


T 3215 H
Gridline Aluminium
Transitions
shadowline angle

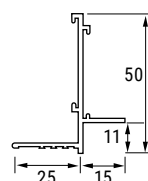

T 3210 H
Gridline Aluminium
Transitions
Integra tiles

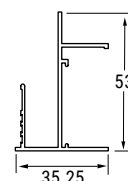


T 3230 A
Gridline Aluminium
Transitions
upstand channel
13mm board

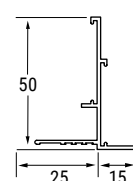


T 3271 A
Gridline Aluminium
Transitions
angle

 
Gridline Aluminium Profiles



 
52 42 06 H
Gridline Aluminium Profiles 50mm



 
54 42 06 H
Gridline Aluminium Profiles 100mm



 
56 42 06 H
Gridline Aluminium Profiles 150mm



 58 42 06 H
Gridline Aluminium Profiles 200mm




55 14 11 G
Gridline Aluminium Profiles 112mm

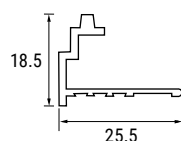


T 3213 H
Gridline Aluminium Profiles
plasterboard trim

Gridline Aluminium Blind Boxes

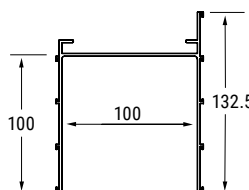

T 3250
Gridline Aluminium
Blind Box 100mm

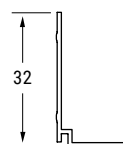

T 3251
Gridline Aluminium
Blind Box
Perimeter Angle

BRC 224.1.11.24

If you would like to order a sample or have any queries about this product please contact our Technical Sales Team on **0800 371 849** or email **info@zentia.com**

zentia.com