

Reliable Fusion – No Confusion

Chemical Piping Systems Electrofusion Machine

The RF-3000LE, Orion's state-of-the-art fusion system, offers a rich set of features designed to satisfy the most demanding chemical waste piping fusion requirements. The compact, lightweight system is splash-proof and shock-resistant, for use at the most challenging construction sites. Enhanced features include multi-joint capability for fast installation, a user-accessible fuse and field-calibration capability.

Benefits Include:

- Easy multi-joint fusion results in faster installation
- Construction-site toughness
- Consistent, quality fusion
- User-friendly, reliable performance
- Adaptability for various applications
- Accountability and peace of mind provided by stored fusion records



To learn more, please contact:


It's more versatile than ever!

Features

- Multi-joint fusion
- Field calibration
- Durable construction
- Downloadable internal memory for data storage
- 4x20 LCD display with replaceable shield
- Two USB ports: one Type A (flash drives) and one Type B (field calibration systems)
- Data storage for as many as 1,000 fusions
- User-accessible fuse
- Lightweight
- Three modes of operation (CF FRPP, PVDF, Manual)
- Preheat cycle for cold weather



Using Rionfuse RFCF electrofusion couplings, the RF-3000LE fuses Orion polypropylene (PP, FRPP) and polyvinylidene fluoride (PVDF) piping systems in 1.5" through 12" connection sizes.

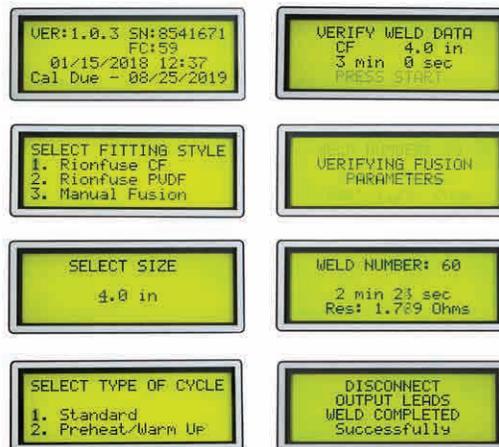

Superior System Integrity



1.5" through 12" fusion

To order the RF-3000LE, contact your local representative.

For more information on all Orion products and their applications, visit www.orionfittings.com



A WATTS Brand

USA: T: (800) 334-6259 • F: (800) 421-6772 • OrionFittings.com
 Canada: T: (905) 332-4090 • F: (905) 332-7068 • OrionFittings.ca
 Latin America: T: (52) 81-1001-8600 1 • OrionFittings.com