


Details des Charges - Plancher : 250 N/m2 Plafond : 250 N/m2 Charge (Habitation) : 1500 N/m2

Posi	Section	Hauteur	Entraxe	Charge
PSS	95x45	198	625	3600
		198	500	3900
		198	417	4000
	120x45	198	625	3900
		198	500	4300
		198	417	4400
	145x45	198	625	4200
		198	500	4600
		198	417	4800
PS9	95x45	221	625	4000
		221	500	4300
		221	417	4600
	120x45	221	625	4400
		221	500	4800
		221	417	5100
	145x45	221	625	4600
		221	500	4900
		221	417	5200
PS10	95x45	249	625	4500
		249	500	4800
		249	417	5200
	120x45	249	625	4800
		249	500	5200
		249	417	5400
	145x45	249	625	5000
		249	500	5400
		249	417	5700
PS12	95x45	300	625	5000
		300	500	5400
		300	417	5600
	120x45	300	625	5200
		300	500	5600
		300	417	5900
	145x45	300	625	5300
		300	500	5700
		300	417	6100
PS14	95x45	369	625	5400
		369	500	5800
		369	417	6200
	120x45	369	625	5500
		369	500	6000
		369	417	6400
	145x45	369	625	5500
		369	500	6100
		369	417	6600
PS16	95x45	417	625	5500
		417	500	6100
		417	417	6500
	120x45	417	625	6000
		417	500	6500
		417	417	6900
	145x45	417	625	6100
		417	500	6600
		417	417	7000


Details des Charges - Plancher : 1550 N/m2 Plafond : 250 N/m2 Charge (Habitation) : 1500 N/m2

Posi	Section	Hauteur	Entraxe	
PS8	95x45	198	625	3200
		198	500	3400
		198	417	3600
	145x45	198	625	3800
		198	500	4000
		198	417	4200
	120x45	198	625	3300
		198	500	3800
		198	417	4000
PS9	95x45	221	625	3400
		221	500	3900
		221	417	4150
	145x45	221	625	4000
		221	500	4600
		221	417	4800
	120x45	221	625	3500
		221	500	4000
		221	417	4400
PS10	95x45	249	625	3400
		249	500	3700
		249	417	4500
	145x45	249	625	4300
		249	500	4900
		249	417	5400
	120x45	249	625	4100
		249	500	4700
		249	417	4900
PS12	95x45	300	625	3400
		300	500	4000
		300	417	4800
	145x45	300	625	4500
		300	500	5000
		300	417	5500
	120x45	300	625	4200
		300	500	4800
		300	417	5300
PS14	95x45	369	625	4000
		369	500	4500
		369	417	5500
	145x45	369	625	4000
		369	500	4700
		369	417	5400
	120x45	369	625	4000
		369	500	4700
		369	417	5400
PS16	95x45	417	625	4300
		417	500	5200
		417	417	5800
	145x45	417	625	4400
		417	500	5200
		417	417	6100
	120x45	417	625	4400
		417	500	5200
		417	417	6100

Detaills des Charges - Toiture : 300 N/m2 Plafond : 250 N/m2 Charge (Neige) : 900 N/m2

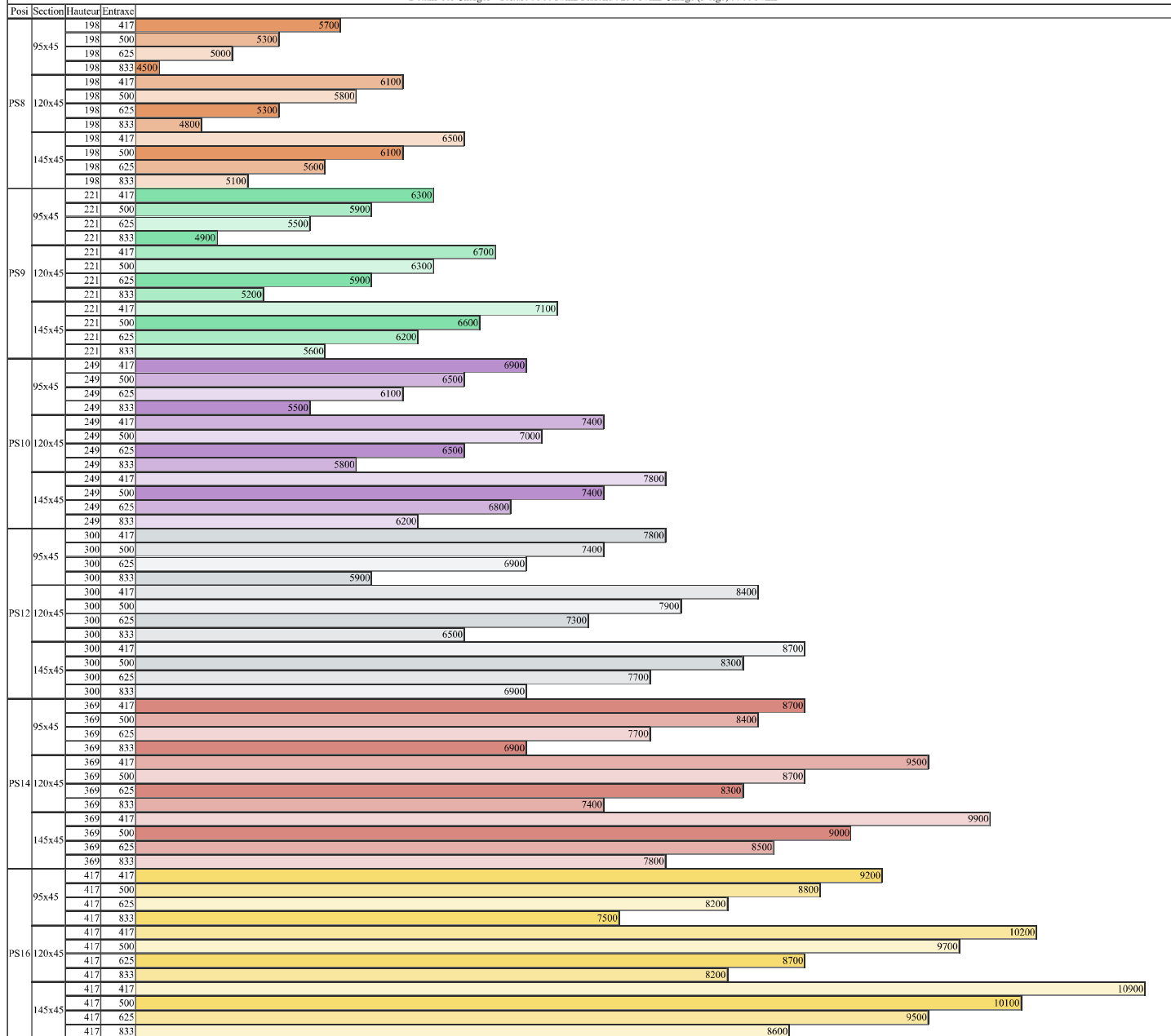

Details des Charges - Toiture : 300 N/m2 Plafond : 250 N/m2 Charge (Neige) : 1300 N/m2

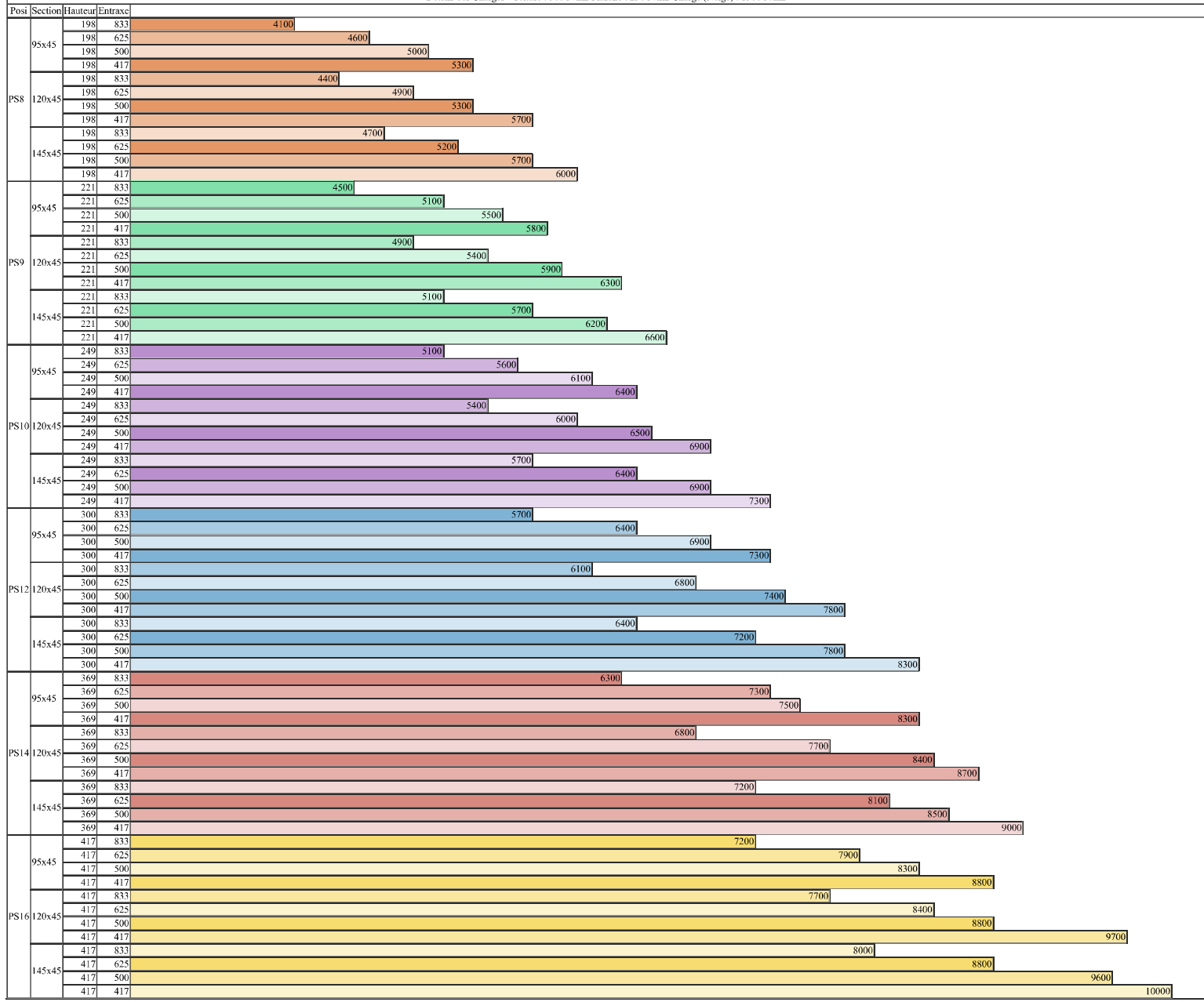

Détails des Charges - Toiture : 1800 N/m2 Plafond : 250 N/m2 Charge (Neige) : 900 N/m2

Posi	Section	Hauteur	Entraxe	Charge
PS8	95x45	198	833	3300
		198	625	3700
		198	500	4000
		198	417	4400
	120x45	198	833	3500
		198	625	4000
		198	500	4400
		198	417	4700
	145x45	198	833	3600
		198	625	4200
		198	500	4600
		198	417	5000
PS9	95x45	221	833	3300
		221	625	4100
		221	500	4500
		221	417	4800
	120x45	221	833	3900
		221	625	4400
		221	500	4800
		221	417	5200
	145x45	221	833	4100
		221	625	4700
		221	500	5100
		221	417	5500
PS10	95x45	249	833	4000
		249	625	4500
		249	500	5000
		249	417	5300
	120x45	249	833	4200
		249	625	4800
		249	500	5300
		249	417	5800
	145x45	249	833	4400
		249	625	5100
		249	500	5700
		249	417	6100
PS12	95x45	300	833	4200
		300	625	5100
		300	500	5700
		300	417	6100
	120x45	300	833	4600
		300	625	5300
		300	500	6000
		300	417	6500
	145x45	300	833	4900
		300	625	5600
		300	500	6200
		300	417	6800
PS14	95x45	369	833	4300
		369	625	5600
		369	500	6300
		369	417	6800
	120x45	369	833	4400
		369	625	5600
		369	500	6600
		369	417	7200
	145x45	369	833	4400
		369	625	5600
		369	500	6600
		369	417	7700
PS16	95x45	417	833	4700
		417	625	6200
		417	500	7100
		417	417	7600
	120x45	417	833	4800
		417	625	6100
		417	500	7300
		417	417	8000
	145x45	417	833	4800
		417	625	6100
		417	500	7300
		417	417	8600

Détails des Charges - Toiture : 1800 N/m2 Plafond : 250 N/m2 Charge (Neige) : 1300 N/m2

Posi	Section	Hauteur	Entraxe	Charge
PS8	95x45	198	833	3100
		198	625	3500
		198	500	4000
		198	417	4300
	120x45	198	833	3300
		198	625	3900
		198	500	4300
		198	417	4600
	145x45	198	833	3600
		198	625	4100
		198	500	4500
		198	417	4900
PS9	95x45	221	833	3300
		221	625	4000
		221	500	4400
		221	417	4700
	120x45	221	833	3700
		221	625	4300
		221	500	4700
		221	417	5100
	145x45	221	833	4000
		221	625	4600
		221	500	4900
		221	417	5300
PS10	95x45	249	833	3500
		249	625	4300
		249	500	4900
		249	417	5200
	120x45	249	833	4100
		249	625	4700
		249	500	5200
		249	417	5600
	145x45	249	833	4300
		249	625	5000
		249	500	5500
		249	417	5900
PS12	95x45	300	833	4200
		300	625	4900
		300	500	5300
		300	417	5900
	120x45	300	833	4400
		300	625	5100
		300	500	5800
		300	417	6200
	145x45	300	833	4700
		300	625	5500
		300	500	6100
		300	417	6600
PS14	95x45	369	833	4100
		369	625	5400
		369	500	6200
		369	417	6700
	120x45	369	833	4300
		369	625	5400
		369	500	6500
		369	417	7100
	145x45	369	833	4300
		369	625	5400
		369	500	6500
		369	417	7500
PS16	95x45	417	833	4600
		417	625	5900
		417	500	6900
		417	417	7400
	120x45	417	833	4700
		417	625	6000
		417	500	7200
		417	417	7900
	145x45	417	833	4700
		417	625	6000
		417	500	7200
		417	417	8400

Details des Charges - Toiture : 500 N/m2 Plafond : 250 N/m2 Charge (Neige) : 1300 N/m2

Posi	Section	Hauteur	Entraxe	
PS8	95x45	210.9312234	900	4400
		204.464017	600	5200
	120x45	213.4852754	900	4800
		213.4315794	600	5600
	145x45	213.4651394	900	5100
		213.4114434	600	5900
PS9	95x45	233.9312234	900	4900
		233.9312234	600	5700
	120x45	233.9312234	900	5300
		246.8654672	600	6100
	145x45	233.9312234	900	5600
		233.9312234	600	6400
PS10	95x45	261.9312234	900	5500
		261.9312234	600	6200
	120x45	261.9312234	900	5900
		261.9312234	600	6700
	145x45	261.9312234	900	6100
		261.9312234	600	7000
PS12	95x45	319.3360535	900	6200
		319.2823575	600	7000
	120x45	312.9312234	900	6600
		312.9312234	600	7400
	145x45	312.9312234	900	6900
		312.9312234	600	7700
PS14	95x45	381.9312234	900	6700
		381.9312234	600	7700
	120x45	381.9312234	900	7200
		381.9312234	600	8100
	145x45	381.9312234	900	7400
		381.9312234	600	8200
PS16	95x45	429.9312234	900	7400
		429.9312234	600	8200
	120x45	429.9312234	900	7800
		429.9312234	600	8400
	145x45	429.9312234	900	8000
		429.9312234	600	8600

Details des Charges - Toiture : 500 N/m2 Plafond : 250 N/m2 Charge (Neige) : 1300 N/m2

Posi	Section	Hauteur	Entraxe	
PS8	95x45	204.4635639	600	4300
		204.4630044	900	5000
	120x45	213.4919874	600	4600
		213.5389714	900	5300
	145x45	213.4718514	600	4900
		213.5322594	900	5700
PS9	95x45	233.9312234	600	4700
		233.9312234	900	5500
	120x45	233.9312234	600	5100
		233.9312234	900	5900
	145x45	233.9312234	600	5400
		233.9312234	900	6200
PS10	95x45	261.9312234	600	5300
		261.9312234	900	6100
	120x45	261.9312234	600	5600
		261.9312234	900	6500
	145x45	261.9312234	600	6000
		261.9312234	900	6900
PS12	95x45	319.3561895	600	5900
		319.4098856	900	6900
	120x45	312.9312234	600	6300
		312.9312234	900	7300
	145x45	312.9312234	600	6700
		312.9312234	900	7500
PS14	95x45	381.9312234	600	6700
		381.9312234	900	7600
	120x45	381.9312234	600	7100
		381.9312234	900	8000
	145x45	381.9312234	600	7300
		381.9312234	900	8200
PS16	95x45	429.9312234	600	7200
		429.9312234	900	8000
	120x45	429.9312234	600	7600
		429.9312234	900	8300
	145x45	429.9312234	600	7900
		429.9312234	900	8500

Details des Charges - Toiture : 500 N/m2 Plafond : 250 N/m2 Charge (Neige) : 1300 N/m2

Posi	Section	Hauteur	Entraxe	
PS8	95x45	227.9015895	600	3700
		226.0033036	900	4100
	120x45	229.040561	600	3900
		227.1422751	900	4400
	145x45	244.7821663	600	4200
		242.8838804	900	4600
PS9	95x45	255.0603121	600	4000
		252.782369	900	4500
	120x45	255.8196264	600	4200
		253.9213406	900	4700
	145x45	256.5789408	600	4400
		254.6806549	900	4900
PS10	95x45	274.8109396	600	4400
		274.8109396	900	4800
	120x45	274.8109396	600	4600
		274.8109396	900	5100
	145x45	305.5026675	600	4700
		305.477539	900	5200
PS12	95x45	325.8109396	600	4700
		325.8109396	900	5200
	120x45	325.8109396	600	5000
		325.8109396	900	5600
	145x45	325.8109396	600	5100
		325.8109396	900	5800
PS14	95x45	394.8109396	600	5100
		394.8109396	900	5700
	120x45	394.8109396	600	5300
		394.8109396	900	6100
	145x45	394.8109396	600	5500
		394.8109396	900	6300
PS16	95x45	442.8109396	600	5400
		442.8109396	900	6100
	120x45	442.8109396	600	5700
		468.4510335	900	6500
	145x45	442.8109396	600	5900
		442.8109396	900	6600

Details des Charges - Toiture : 500 N/m2 Plafond : 250 N/m2 Charge (Neige) : 1300 N/m2

Posi	Section	Hauteur	Entraxe	
PS8	95x45	229.8198052	900	3200
		229.8198052	600	3600
	120x45	229.8198052	900	3300
		229.8198052	600	3700
	145x45	229.8198052	900	3500
		229.8198052	600	3900
PS9	95x45	252.8198052	900	3200
		252.8198052	600	3600
	120x45	252.8198052	900	3600
		252.8198052	600	4000
	145x45	252.8198052	900	3700
		252.8198052	600	4200
PS10	95x45	280.8198052	900	3600
		280.8198052	600	4100
	120x45	280.8198052	900	3900
		280.8198052	600	4300
	145x45	280.8198052	900	4000
		280.8198052	600	4500
PS12	95x45	331.8198052	900	4000
		331.8198052	600	4500
	120x45	331.8198052	900	4200
		331.8198052	600	4700
	145x45	331.8198052	900	4400
		331.8198052	600	4900
PS14	95x45	400.8198052	900	4300
		400.8198052	600	4900
	120x45	400.8198052	900	4600
		400.8198052	600	5100
	145x45	400.8198052	900	4800
		400.8198052	600	5400
PS16	95x45	448.8217627	900	4600
		448.8217772	600	5300
	120x45	448.821768	900	4800
		448.8217813	600	5500
	145x45	448.8217728	900	5100
		448.8217851	600	5700

Details des Charges - Plancher : 250 N/m2 Plafond : 250 N/m2 Charge (Bureau) : 2500 N/m2

Posi	Section	Hauteur	Entraxe	Charge
PS8	95x45	198	625	2800
		198	500	3200
		198	417	3600
	120x45	198	625	3200
		198	500	3500
		198	417	3900
	145x45	198	625	3400
		198	500	3800
		198	417	4100
PS9	95x45	221	625	3400
		221	500	3800
		221	417	4000
	120x45	221	625	3600
		221	500	4100
		221	417	4400
	145x45	221	625	3900
		221	500	4200
		221	417	4600
PS10	95x45	249	625	3500
		249	500	4000
		249	417	4400
	120x45	249	625	3900
		249	500	4500
		249	417	4800
	145x45	249	625	4200
		249	500	4700
		249	417	5100
PS12	95x45	300	625	4100
		300	500	4600
		300	417	5000
	120x45	300	625	4300
		300	500	4900
		300	417	5400
	145x45	300	625	4500
		300	500	5100
		300	417	5600
PS14	95x45	369	625	4200
		369	500	5000
		369	417	5400
	120x45	369	625	4200
		369	500	5000
		369	417	5800
	145x45	369	625	4200
		369	500	5000
		369	417	5800
PS16	95x45	417	625	4600
		417	500	5500
		417	417	6100
	120x45	417	625	4600
		417	500	5600
		417	417	6500
	145x45	417	625	4600
		417	500	5600
		417	417	6500

Details des Charges - Plancher : 250 N/m² Plafond : 250 N/m² Charge (Habitation) : 1500 N/m²

Posi	Section	Hauteur	Entraxe	
PS8	120x80	268	625	5300
		268	500	5600
		268	417	5900
PS9	120x80	291	625	5600
		291	500	6000
		291	417	6200
PS10	120x80	319	625	5800
		319	500	6100
		319	417	6600
PS12	120x80	370	625	6100
		370	500	6600
		370	417	7000
PS14	120x80	439	625	5900
		439	500	7100
		439	417	7300
PS16	120x80	487	625	6200
		487	500	7400
		487	417	7900

Details des Charges - Plancher : 250 N/m2 Plafond : 250 N/m2 Charge (Bureau) : 2500 N/m2

Posi	Section	Hauteur	Entraxe	
PS8	95x45	226.762618	900	3800
		228.6609038	600	4200
	120x45	227.5219323	900	4000
		229.4202182	600	4400
	145x45	243.6431947	900	4200
		245.1618234	600	4700
PS9	95x45	253.5416834	900	4100
		255.4399693	600	4600
	120x45	254.6806549	900	4300
		256.1992836	600	4800
	145x45	255.0603121	900	4500
		256.958598	600	5000
PS10	95x45	274.8109396	900	4400
		274.8109396	600	4900
	120x45	274.8109396	900	4600
		274.8109396	600	5200
	145x45	274.8109396	900	4800
		274.8109396	600	5300
PS12	95x45	325.8109396	900	4700
		325.8109396	600	5300
	120x45	325.8109396	900	5000
		325.8109396	600	5600
	145x45	325.8109396	900	5200
		325.8109396	600	5800
PS14	95x45	394.8109396	900	5100
		394.8109396	600	5800
	120x45	397.0471988	900	5600
		399.704799	600	6200
	145x45	394.8109396	900	5700
		446.0911275	600	6300
PS16	95x45	442.8109396	900	5500
		442.8109396	600	6200
	120x45	442.8109396	900	5900
		442.8109396	600	6600
	145x45	442.8109396	900	6200
		442.8109396	600	6800

Details des Charges - Plancher : 250 N/m2 Plafond : 250 N/m2 Charge (Bureau) : 2500 N/m2

Posi	Section	Hauteur	Entraxe	
PS8	95x45	229.8198052	900	3100
		229.8198052	600	3500
	120x45	229.8198052	900	3300
		229.8198052	600	3700
	145x45	229.8198052	900	3400
		229.8198052	600	3800
PS9	95x45	252.8198052	900	3300
		252.8198052	600	3700
	120x45	252.8198052	900	3500
		252.8198052	600	3900
	145x45	252.8198052	900	3600
		252.8198052	600	4100
PS10	95x45	280.8198052	900	3500
		280.8198052	600	4000
	120x45	280.8198052	900	3800
		280.8198052	600	4200
	145x45	280.8198052	900	3900
		280.8198052	600	4400
PS12	95x45	331.8198052	900	3900
		331.8198052	600	4400
	120x45	331.8198052	900	4100
		331.8198052	600	4600
	145x45	331.8198052	900	4300
		331.8198052	600	4800
PS14	95x45	400.8198052	900	4200
		400.8198052	600	4800
	120x45	400.8198052	900	4400
		400.8198052	600	5000
	145x45	400.8198052	900	4600
		400.8198052	600	5300
PS16	95x45	448.8217539	900	4300
		448.821775	600	5100
	120x45	448.8217627	900	4600
		448.8217813	600	5400
	145x45	448.821768	900	4800
		448.8217851	600	5600

Détails des Charges - Plancher : 1550 N/m2 Plafond : 250 N/m2 Charge (Bureau) : 2500 N/m2

Posi	Section	Hauteur	Entraxe	Charge (N/m)
PS8	95x45	198	625	2800
		198	500	3100
		198	417	3300
	120x45	198	625	2900
		198	500	3200
		198	417	3700
	145x45	198	625	3100
		198	500	3300
		198	417	3900
PS9	95x45	221	625	3100
		221	500	3300
		221	417	3700
	120x45	221	625	3300
		221	500	3800
		221	417	4100
	145x45	221	625	3400
		221	500	4000
		221	417	4400
PS10	95x45	249	625	3300
		249	500	3800
		249	417	4000
	120x45	249	625	3700
		249	500	4000
		249	417	4500
	145x45	249	625	3800
		249	500	4400
		249	417	4700
PS12	95x45	300	625	3800
		300	500	4100
		300	417	4600
	120x45	300	625	3900
		300	500	4500
		300	417	4900
	145x45	300	625	3900
		300	500	4700
		300	417	5200
PS14	95x45	369	625	4500
		369	500	5200
		369	417	5700
	120x45	369	625	4800
		369	500	5700
		369	417	6100
	145x45	369	625	5500
		369	500	6000
		369	417	6400
PS16	95x45	417	625	4700
		417	500	5400
		417	417	5900
	120x45	417	625	5000
		417	500	5800
		417	417	6300
	145x45	417	625	5700
		417	500	6200
		417	417	7100

Detais des Charges - Plancher : 250 N/m2 Plafond : 250 N/m2 Charge (Habitation) : 1500 N/m2

Posi	Section	Hauteur	Entraxe	Charge
PS8	36x97	302	625	4300
		302	500	4700
		302	417	4800
	36x122	352	625	5000
		352	500	5500
		352	417	5700
	36x147	402	625	5700
		402	500	6000
		402	417	6300
PS9	36x97	325	625	4600
		325	500	4900
		325	417	5300
	36x122	375	625	5400
		375	500	5700
		375	417	6000
	36x147	425	625	5900
		425	500	6200
		425	417	6500
PS10	36x97	353	625	4900
		353	500	5400
		353	417	5600
	36x122	403	625	5600
		403	500	6000
		403	417	6300
	36x147	453	625	6200
		453	500	7000
		453	417	7400
PS12	36x97	404	625	5400
		404	500	5700
		404	417	6100
	36x122	454	625	6000
		454	500	6300
		454	417	7000
	36x147	504	625	6400
		504	500	7600
		504	417	8100
PS14	36x97	473	625	5700
		473	500	6100
		473	417	7100
	36x122	523	625	6300
		523	500	7400
		523	417	8000
	36x147	573	625	7100
		573	500	8200
		573	417	8400
PS16	36x97	521	625	6100
		521	500	7200
		521	417	7500
	36x122	571	625	7400
		571	500	8100
		571	417	8400
	36x147	621	625	7900
		621	500	8400
		621	417	8900

Détails des Charges - Plancher : 250 N/m2 Plafond : 250 N/m2 Charge (Habitation) : 1500 N/m2

Posi	Section	Hauteur	Entraxe	Charge (N/m)
PS8	45x95	298	625	4500
		298	500	5000
		298	417	5200
	45x120	348	625	5400
		348	500	5700
		348	417	5900
	45x145	398	625	5900
		398	500	6300
		398	417	6500
		321	625	4900
PS9	45x95	321	500	5200
		321	417	5500
		371	625	5600
	45x120	371	500	5900
		371	417	6200
		421	625	6100
	45x145	421	500	6500
421		417	6800	
PS10	45x95	349	625	5200
		349	500	5600
		349	417	5800
	45x120	399	625	5900
		399	500	6200
		399	417	6500
	45x145	449	625	6900
		449	500	7400
449	417	7700		
PS12	45x95	400	625	5600
		400	500	6000
		400	417	6300
	45x120	450	625	6200
		450	500	7100
		450	417	7600
	45x145	500	625	7000
		500	500	8000
500	417	8400		
PS14	45x95	469	625	6000
		469	500	7000
		469	417	7400
	45x120	519	625	7100
		519	500	7800
		519	417	8300
	45x145	569	625	8000
		569	500	8300
569	417	8800		
PS16	45x95	517	625	7000
		517	500	7600
		517	417	8100
	45x120	567	625	7800
		567	500	8300
		567	417	8600
	45x145	617	625	8400
		617	500	8800
617	417	9300		

Details des Charges - Toiture : 300 N/m2 Plafond : 250 N/m2 Charge (Neige) : 900 N/m2				
Posi	Section	Hauteur	Entraxe	
PS8	36x97	302	833	5300
		302	625	5800
		302	500	6300
		302	417	6700
	36x122	352	833	6200
		352	625	6800
		352	500	7300
		352	417	7800
	36x147	402	833	7100
		402	625	7800
		402	500	8400
		402	417	8800
PS9	36x97	325	833	5700
		325	625	6300
		325	500	6700
		325	417	7200
	36x122	375	833	6500
		375	625	7200
		375	500	7800
		375	417	8200
	36x147	425	833	7400
		425	625	8200
		425	500	8700
		425	417	9300
PS10	36x97	353	833	6100
		353	625	6700
		353	500	7200
		353	417	7700
	36x122	403	833	7000
		403	625	7700
		403	500	8300
		403	417	8800
	36x147	453	833	7800
		453	625	8400
		453	500	9200
		453	417	9600
PS12	36x97	404	833	6700
		404	625	7400
		404	500	8000
		404	417	8400
	36x122	454	833	7600
		454	625	8400
		454	500	8700
		454	417	9500
	36x147	504	833	8400
		504	625	8900
		504	500	9600
		504	417	10100
PS14	36x97	473	833	7400
		473	625	8100
		473	500	8600
		473	417	9000
	36x122	523	833	8100
		523	625	8700
		523	500	9400
		523	417	9800
	36x147	573	833	8600
		573	625	9500
		573	500	9900
		573	417	10400
PS16	36x97	521	833	7800
		521	625	8500
		521	500	8800
		521	417	9400
	36x122	571	833	8400
		571	625	9200
		571	500	9600
		571	417	10000
	36x147	621	833	8800
		621	625	9600
		621	500	10100
		621	417	10600

Details des Charges - Toiture : 300 N/m2 Plafond : 250 N/m2 Charge (Neige) : 900 N/m2

Posi	Section	Hauteur	Entraxe	
PSS	45x95	298	833	5600
		298	625	6200
		298	500	6600
		298	417	7100
	45x120	348	833	6500
		348	625	7200
		348	500	7800
		348	417	8200
	45x145	398	833	7500
		398	625	8200
		398	500	8700
		398	417	9300
PS9	45x95	321	833	6000
		321	625	6600
		321	500	7100
		321	417	7500
	45x120	371	833	6900
		371	625	7600
		371	500	8200
		371	417	8600
	45x145	421	833	7800
		421	625	8600
		421	500	9100
		421	417	9700
PS10	45x95	349	833	6400
		349	625	7100
		349	500	7600
		349	417	8100
	45x120	399	833	7400
		399	625	8100
		399	500	8700
		399	417	9100
	45x145	449	833	8300
		449	625	9000
		449	500	9700
		449	417	10200
PS12	45x95	400	833	6900
		400	625	7600
		400	500	8400
		400	417	8800
	45x120	450	833	8100
		450	625	8800
		450	500	9500
		450	417	10000
	45x145	500	833	8800
		500	625	9700
		500	500	10500
		500	417	11100
PS14	45x95	469	833	7800
		469	625	8600
		469	500	9100
		469	417	9900
	45x120	519	833	8700
		519	625	9700
		519	500	10400
		519	417	11100
	45x145	569	833	9500
		569	625	10600
		569	500	11400
		569	417	12200
PS16	45x95	517	833	8400
		517	625	9100
		517	500	10000
		517	417	10600
	45x120	567	833	9300
		567	625	10300
		567	500	10800
		567	417	11500
	45x145	617	833	10200
		617	625	10800
		617	500	11700
		617	500	12400