

# CHIODO collection

design by  
Danesi & Buzzoni

Platek®

CHIODO collection

item code: DOC\_CHIODO  
This document is available for  
download from our website  
[www.platek.eu](http://www.platek.eu)

The data in this document are valid  
on the print date indicated above.  
Any updates are available  
on our website [www.platek.eu](http://www.platek.eu)

THANKS TO

DANESI & BUZZONI

# CHIODO collection

design by  
Danesi & Buzzoni

**Platek®**



# bollard spike wall mounted







A family of bollards in three heights. Very simple design, the products Chiodo can be used both hidden inside the bushes, or in view. In the first case it highlights the lighting capacity, generating an intense light particularly suitable for scenic lighting of gardens or large vases with flowers and greenery. In the second case it can create magical compositions by using elements of different

heights, such as small forests of pure light. Chiodo can be fixed in the ground by its spike, or on the floor through a small base. The product is available also in the applique version, which radiates the wall with a soft light and creates a unique and suggestive atmosphere. Chiodo applique can be used in different combinations, that give life to original lighting effects.







CHIODO



DECORATIVE OUTDOOR LIGHTING

DECORATIVE OUTDOOR LIGHTING









DECORATIVE OUTDOOR LIGHTING

DECORATIVE OUTDOOR LIGHTING

CHIODO










DECORATIVE OUTDOOR LIGHTING

DECORATIVE OUTDOOR LIGHTING












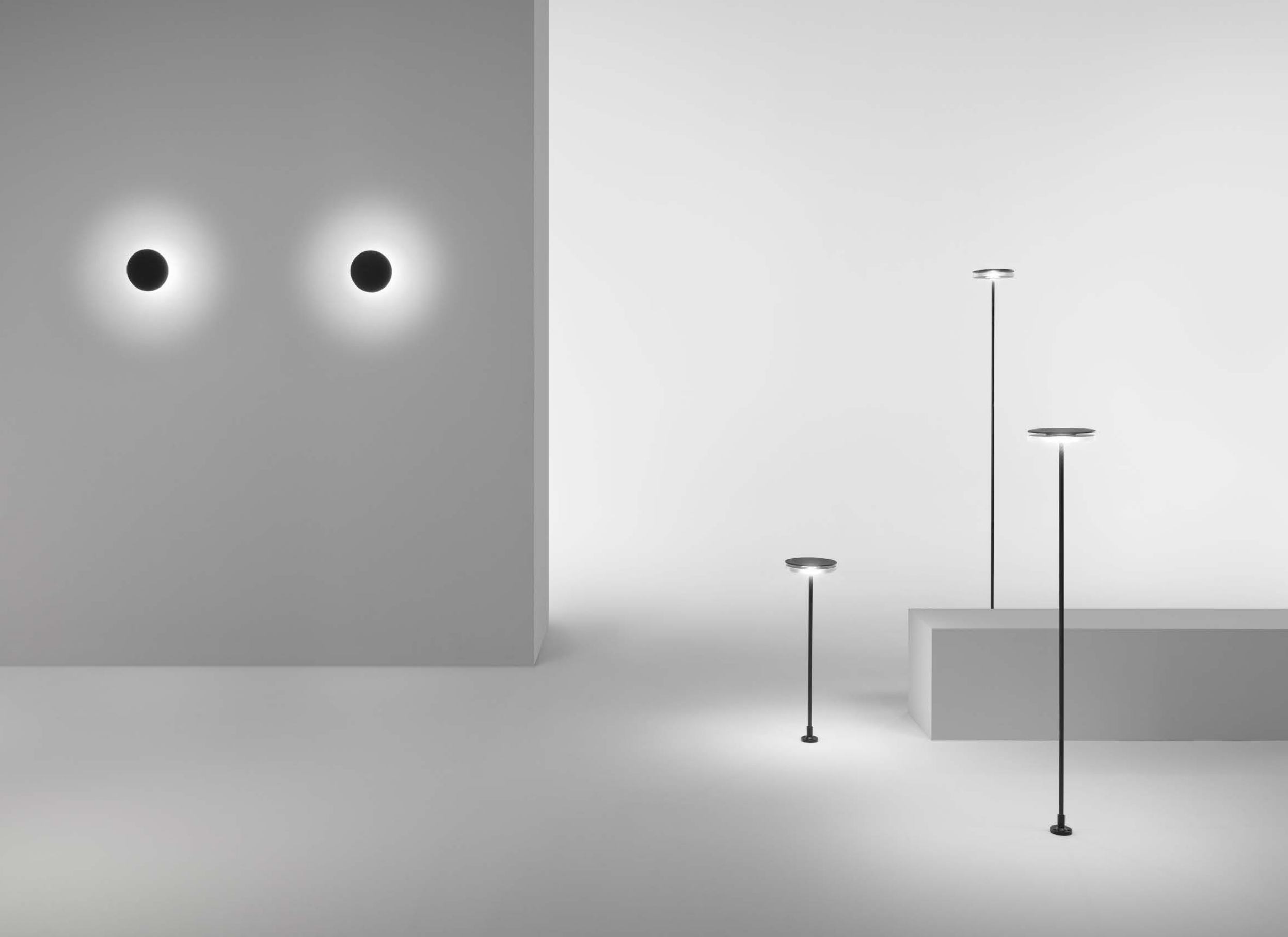

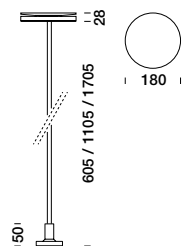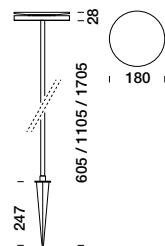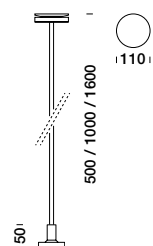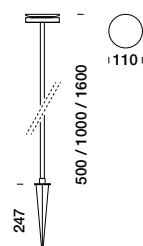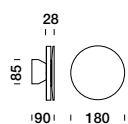

CHIODO  
bollardIP65  
IK 07CHIODO  
spikeIP65  
IK 07CHIODINO  
bollardIP65  
IK 07CHIODINO  
spikeIP65  
IK 07CHIODO  
wall mountedIP65  
IK 05

## CHIODO bollard / spike

WHITE LED

3000K CRI>80  
220-240V 50/60Hz ⊕

→ h. 600 mm

12W | 595 lm (\*)  
diffuse

→ h. 1100 mm

12W | 595 lm (\*)  
diffuse

→ h. 1700 mm

12W | 595 lm (\*)  
93° diffuse

## CHIODINO bollard / spike

WHITE LED

3000K CRI>90  
24V DC ⬡

→ h. 500 mm

6W | 430/300 lm (\*)  
diffuse

→ h. 1000 mm

6W | 430/300 lm (\*)  
diffuse

→ h. 1600 mm

6W | 430/300 lm (\*)  
93° diffuse

## CHIODO wall effect

WHITE LED

3000K CRI>80  
220-240V 50/60Hz ⊕12W | 340 lm (\*)  
121° diffuse

(\*) Real Data



Platek Srl  
Registered Office: Via Paderno, 19  
Head Office: Via Marrocco, 4  
25050—Rodengo Saiano (BS),  
Italy  
P.Iva 03320290178  
C.F. 03007130176

T +39 030 68 18 201  
F +39 030 68 16 567  
info@platek.eu  
www.platek.eu

Art Direction  
Gusto IDS  
Platek  
  
Graphic design  
Gusto IDS  
Platek

Photo  
Germano Borrelli  
Metalli Photo Design  
Ottavio Tomasini

© Platek 2020

Platek online  
[facebook.com/platek](https://facebook.com/platek)  
[twitter.com/platek](https://twitter.com/platek)  
[instagram.com/platek](https://instagram.com/platek)  
[youtube.com/platek](https://youtube.com/platek)



