

TARSIUS collection

design by
Piero Castiglioni

Platek®

TARSIUS collection

item code: DOC_TARSIUS

This document is available for
download from our website
www.platek.eu

The data in this document are valid
on the print date indicated above.
Any updates are available
on our website www.platek.eu

THANKS TO

PIERO CASTIGLIONI

TARSIUS collection

design by
Piero Castiglioni

Platek®

floodlight urban lighting





Series of pole-top floodlights from minimalist form, both for the lines and for volumes that are discreet and pleasing to the eye. Tarsius is equipped with a swivel adjustable with a pitch of 10°. A product designed

to illuminate public areas, squares, car parks, cycle paths, it is also available in a version with smart driver which self-reduces the flow after midnight. Tarsius is normally installed on poles with a height ranging between 4 and 8 meters.





TARSIVS floodlight pole-top



ARCHITECTURAL OUTDOOR LIGHTING




ARCHITECTURAL OUTDOOR LIGHTING

TARSIVS floodlight pole-top

TARSIOUS floodlight pole-top



ARCHITECTURAL OUTDOOR LIGHTING

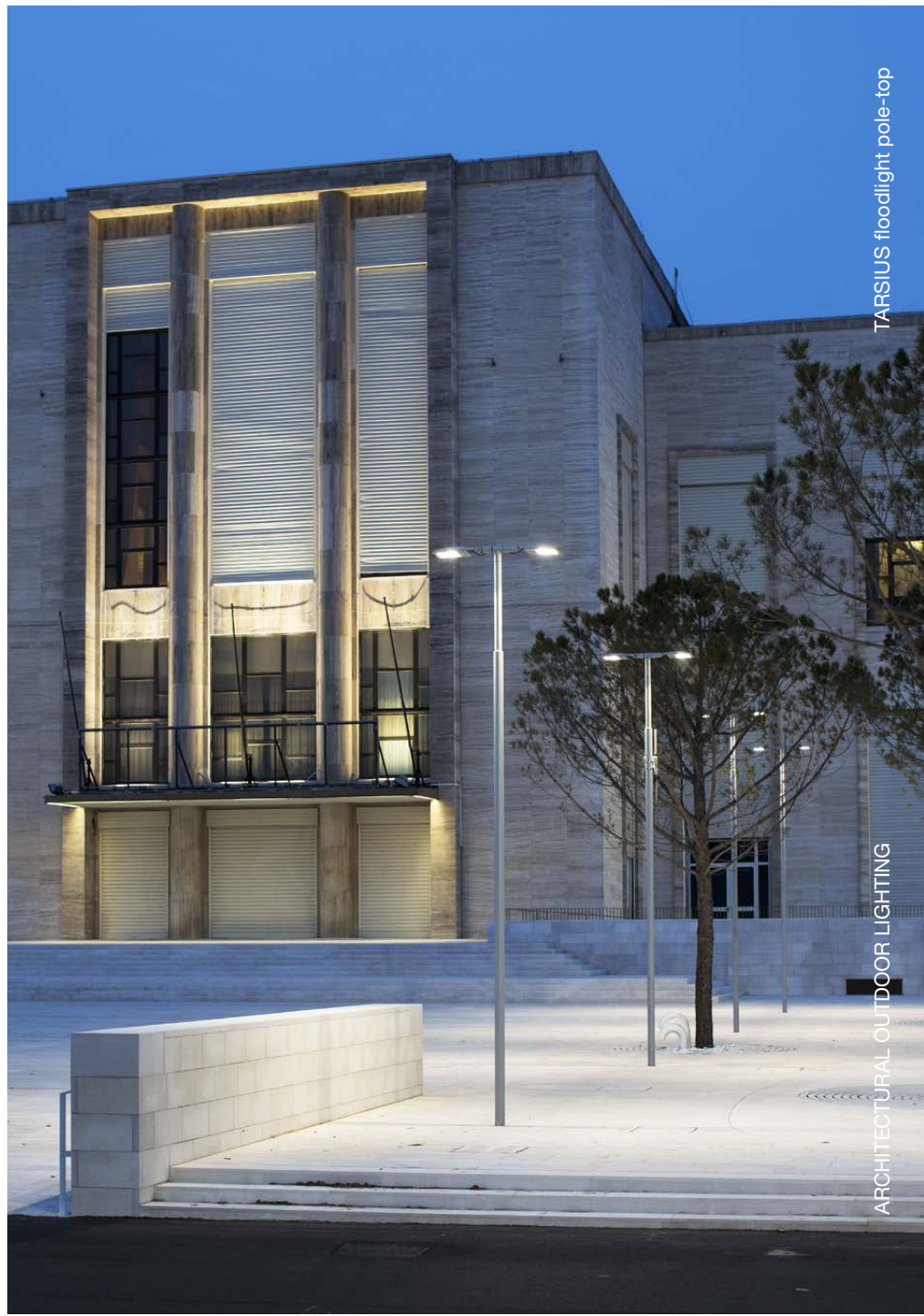

TARSIOUS floodlight pole-top

ARCHITECTURAL OUTDOOR LIGHTING



ARCHITECTURAL OUTDOOR LIGHTING

ARCHITECTURAL OUTDOOR LIGHTING

TARSILIUS floodlight pole-top

TARSIVUS floodlight pole-top



ARCHITECTURAL OUTDOOR LIGHTING

 
TARSIVUS floodlight pole-top



ARCHITECTURAL OUTDOOR LIGHTING



TARSISIUS
floodlight




IP66
IK 10

4 mm methacrylate
transparent diffuser

0,5 m cable length

TARSISIUS
floodlight pole-top

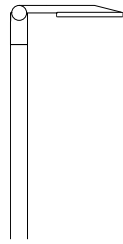


IP66
IK 10

4 mm methacrylate
transparent diffuser

pole available on request

8 m cable length

TARSISIUS
floodlight pole-top

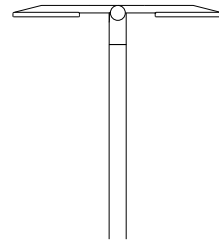

IP66
IK 10

4 mm methacrylate
transparent diffuser

pole available on request

8 m cable length

standard finishes



.06 grey

on request finishes



 
.01 black



.07 corten



.09 bronze




.02 white



.08 anthracite

TARSISIUS floodlight / floodlight pole-top

WHITE LED

3000K CRI>80
220-240V 50/60 Hz 
DALI dimmable

2200K / 2700K / 4000K
available on request

→ street optic




54W | 5770 lm (*)
street optic

→ asymmetrical



54W | 4020 lm (*)
asymmetrical

WHITE LED

3000K CRI>80
220-240V 0/50/60 Hz 
MIDNIGHT system included

2200K / 2700K / 4000K
available on request

→ street optic



49W | 4900 lm (*)
street optic

→ asymmetrical



49W | 3685 lm (*)
asymmetrical

(*) Real Data

Platek Srl
Registered Office: Via Paderno, 19
Head Office: Via Marrocco, 4
25050—Rodengo Saiano (BS),
Italy
P.Iva 03320290178
C.F. 03007130176

T +39 030 68 18 201
F +39 030 68 16 567
info@platek.eu
www.platek.eu

Art Direction
Gusto IDS
Platek

Graphic design
Gusto IDS
Platek

Photo
Metalli Photo Design
Ottavio Tomasini
Archivio Platek

© Platek 2020

Platek online
facebook.com/platek
twitter.com/platek
instagram.com/platek
youtube.com/platek
pinterest.it/platek

