

MENHIR collection



design by
Lundbergdesign

Platek®

MENHIR collection

item code: DOC_MENHIR

This document is available for
download from our website
www.platek.eu

The data in this document are valid
on the print date indicated above.
Any updates are available
on our website www.platek.eu

THANKS TO

LUNDBERGDESIGN

MENHIR collection

design by
Lundbergdesign

Platek®


bollard





Menhir and Micro Menhir belong to two families with the same elegant and clean impression from linear but evocative drawing. A very effective graphic gesture: a cylindrical base supports the diffuser that, when switched on, reproduces the circular shape of the


body on the surface where it is installed. Menhir is the version from the greater dimensions, more apt to public spaces, while Micro Menhir is perfect for private gardens and parks. It is available in three heights and with light distribution on 180° and 360°.

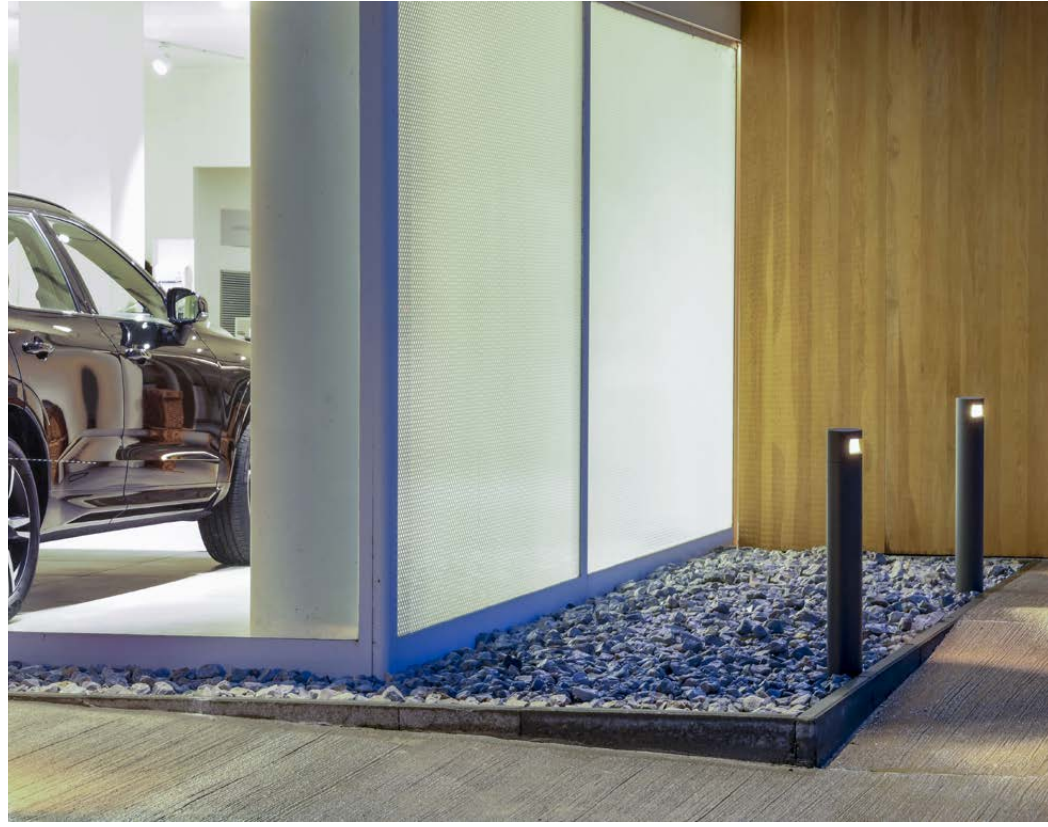









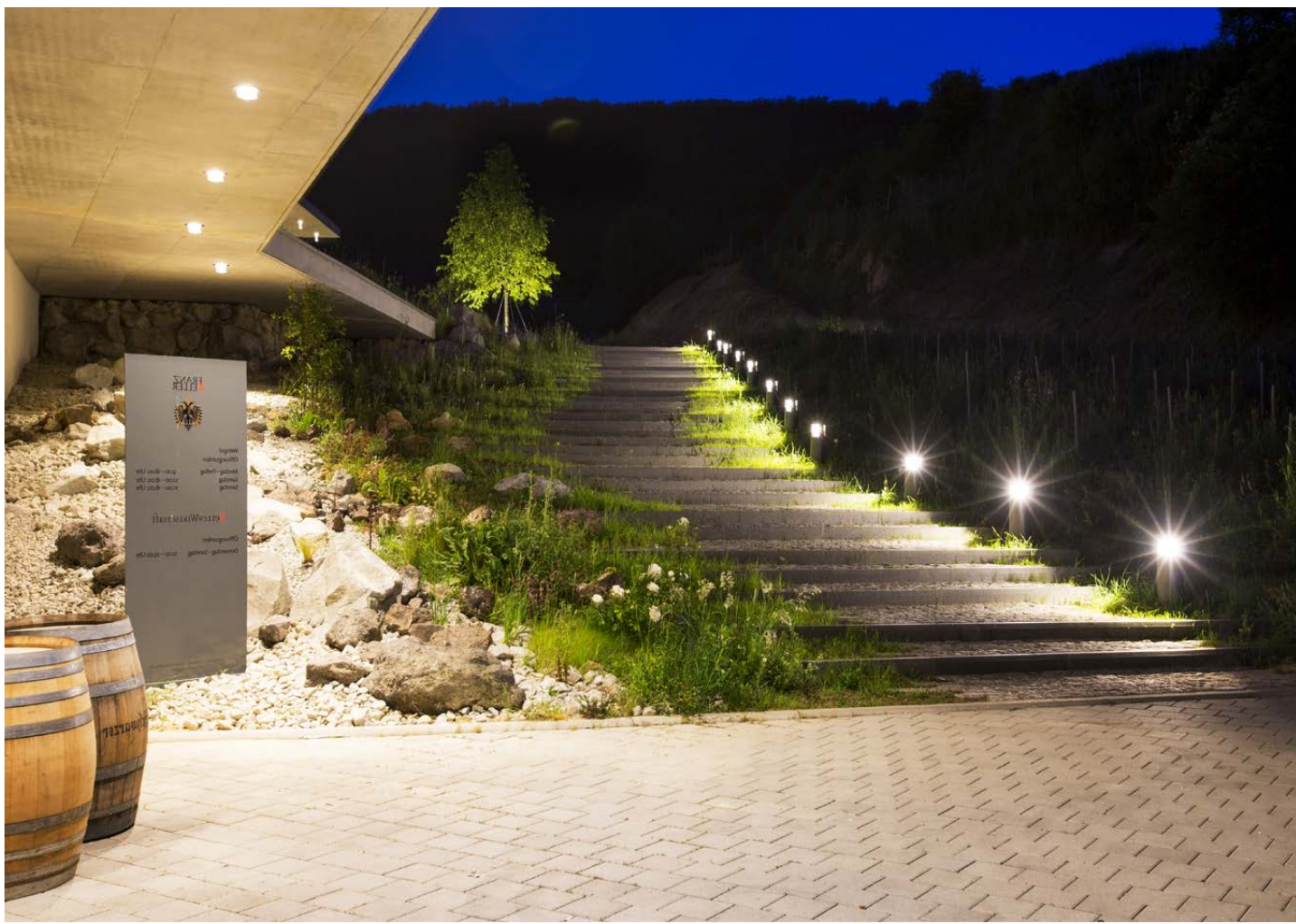

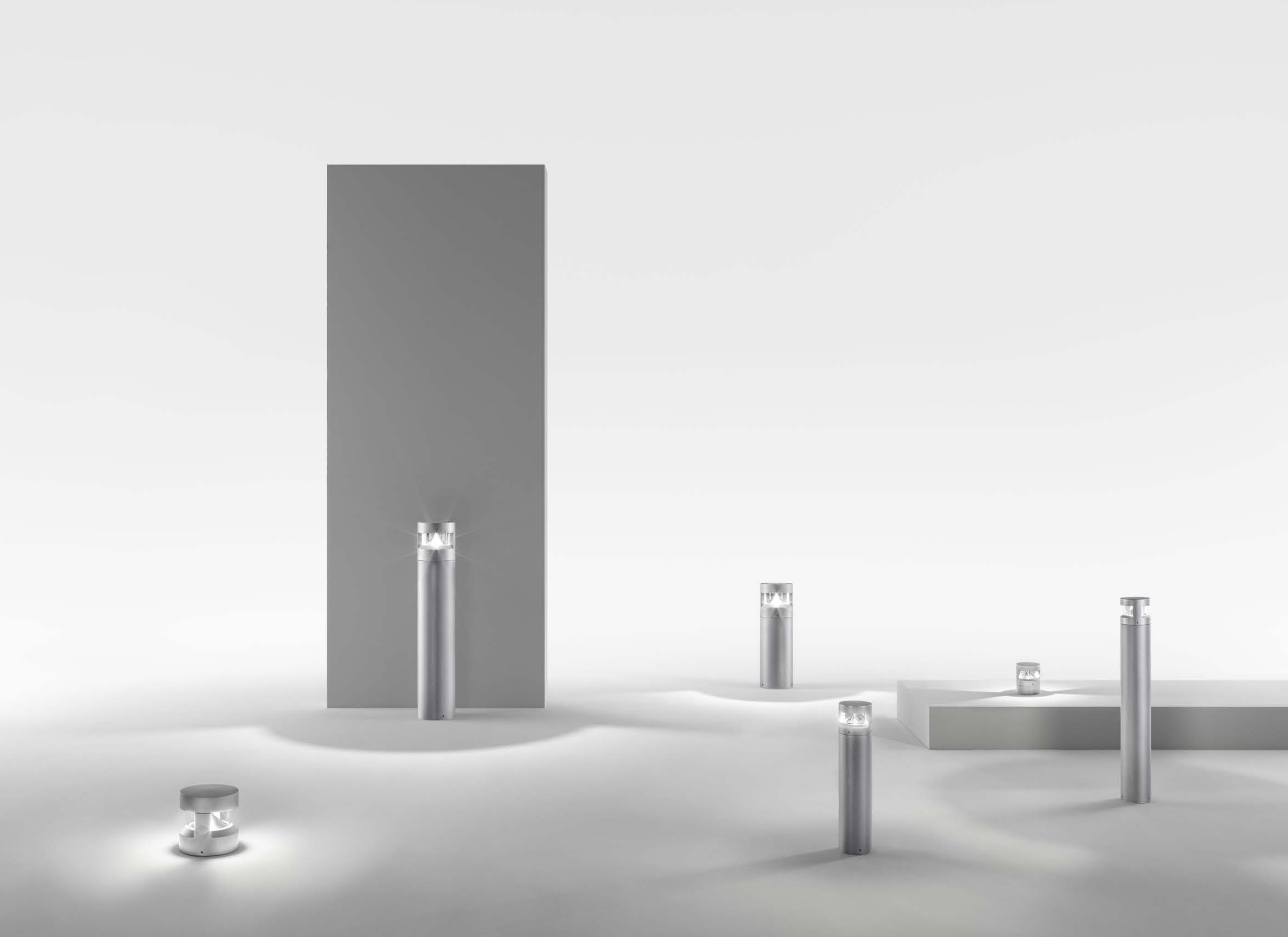

MICRO MENHIR bollard

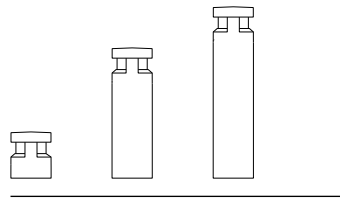

IP65
IK 10

2 mm transparent
methacrylate

ø 115 x h. 150 mm
ø 115 x h. 500 mm
ø 115 x h. 800 mm

MICRO MENHIR bollard

WHITE COB LED

3000K CRI>80
220-240V 50/60Hz ⚡
dimmable TRIAC

2700K / 4000K
available on request

→ ø 115 x h. 150 mm



9,6W | 255 lm (*)
1 opening

→ ø 115 x h. 500 mm



16W | 340 lm (*)
1 opening

→ ø 115 x H. 800 mm



16W | 340 lm (*)
1 opening

→ ø 115 x h. 150 mm



9,6W | 500 lm (*)
2 openings

→ ø 115 x h. 500 mm



16W | 665 lm (*)
2 openings

→ ø 115 x H. 800 mm



16W | 665 lm (*)
2 openings

standard finishes




on request finishes



(*) Real Data

MENHIR bollard

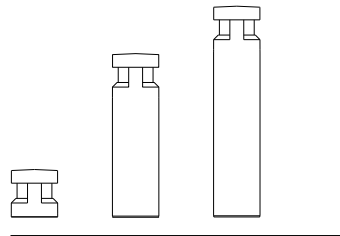

IP65
IK 08

5 mm transparent
borosilicate glass

ø 200 × h. 200 mm
ø 200 × h. 620 mm
ø 200 × h. 1050 mm

MENHIR bollard

WHITE COB LED

3000K CRI>80
220-240V 50/60Hz Ⓢ
dimmable TRIAC

2700K / 4000K
available on request

→ ø 200 × h. 200 mm



15,5W | 510 lm (*)
1 opening

→ ø 200 × h. 620 mm



20W | 775 lm (*)
1 opening

→ ø 115 × H. 800 mm



40W | 1430 lm (*)
1 opening

→ ø 200 × h. 200 mm



15,5W | 915 lm (*)
2 openings

→ ø 200 × h. 620 mm



20W | 1240 lm (*)
2 openings

→ ø 200 × h. 1050 mm




40W | 2500 lm (*)
2 openings

standard finishes



 on request finishes



(*) Real Data

Platek Srl
Registered Office: Via Paderno, 19
Head Office: Via Marrocco, 4
25050—Rodengo Saiano (BS),
Italy
P.Iva 03320290178
C.F. 03007130176

T +39 030 68 18 201
F +39 030 68 16 567
marketing@platek.eu
www.platek.eu

Art Direction
Gusto IDS
Platek

Graphic design
Gusto IDS
Platek

Photo
Metalli Photo Design
Ottavio Tomasini
Alberto Piva

© Platek 2021

Platek online
facebook.com/platek
twitter.com/platek
instagram.com/platek
youtube.com/platek
pinterest.it/platek

