

TUBE collection



Platek®

TUBE collection

item code: DOC_TUBE

This document is available for
download from our website
www.platek.eu

The data in this document are valid
on the print date indicated above.
Any updates are available
on our website www.platek.eu

TUBE collection


lighting post urban lighting





Functionality, energy saving and minimalist style are the features of the new stalks and TUBE posts, a polyfunctional collection for urban furniture that adapts to environments classical and contemporary.

The perfect union between essentiality of volumes and structural solidity, is ideal for projects of spaces in public and private areas, made for sustainability and for the formal harmony.

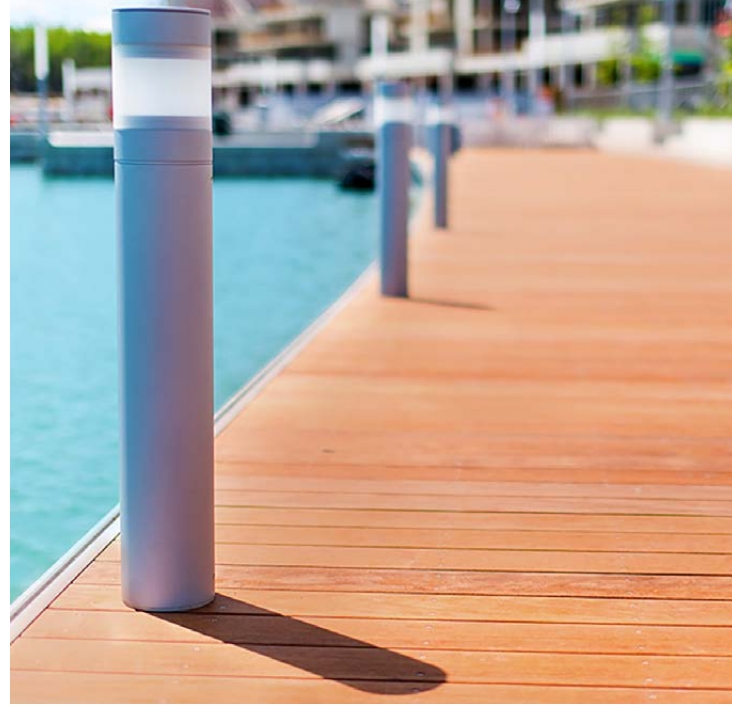



TUBE lighting post




ARCHITECTURAL OUTDOOR LIGHTING



TUBE lighting post

ARCHITECTURAL OUTDOOR LIGHTING

TUBE lighting post

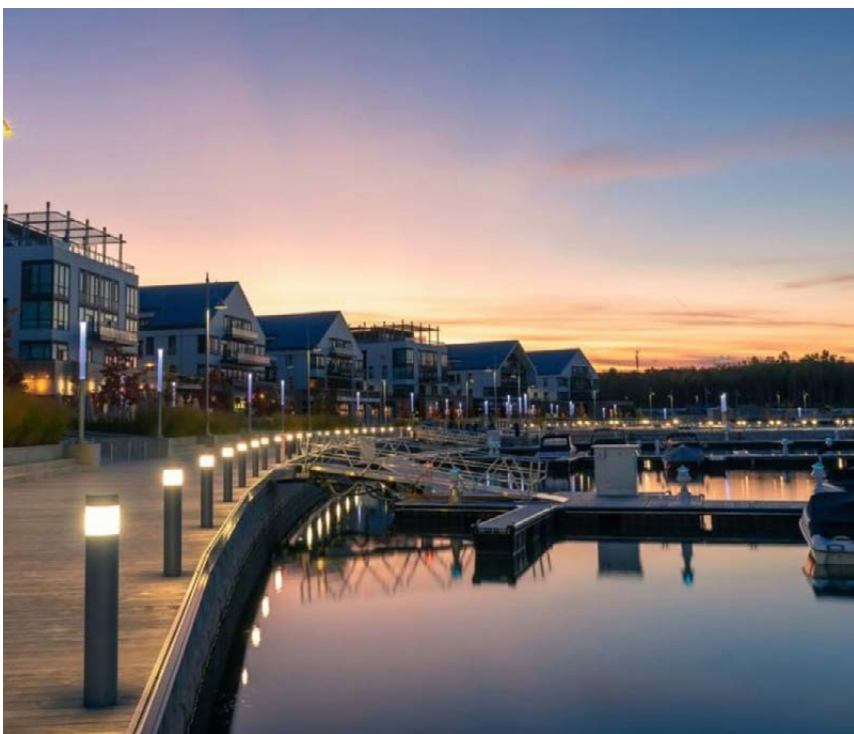

ARCHITECTURAL OUTDOOR LIGHTING

TUBE urban lighting



ARCHITECTURAL OUTDOOR LIGHTING





ARCHITECTURAL OUTDOOR LIGHTING

ARCHITECTURAL OUTDOOR LIGHTING

TUBE lighting post / urban lighting




ARCHITECTURAL OUTDOOR LIGHTING




TUBE urban lighting

ARCHITECTURAL OUTDOOR LIGHTING

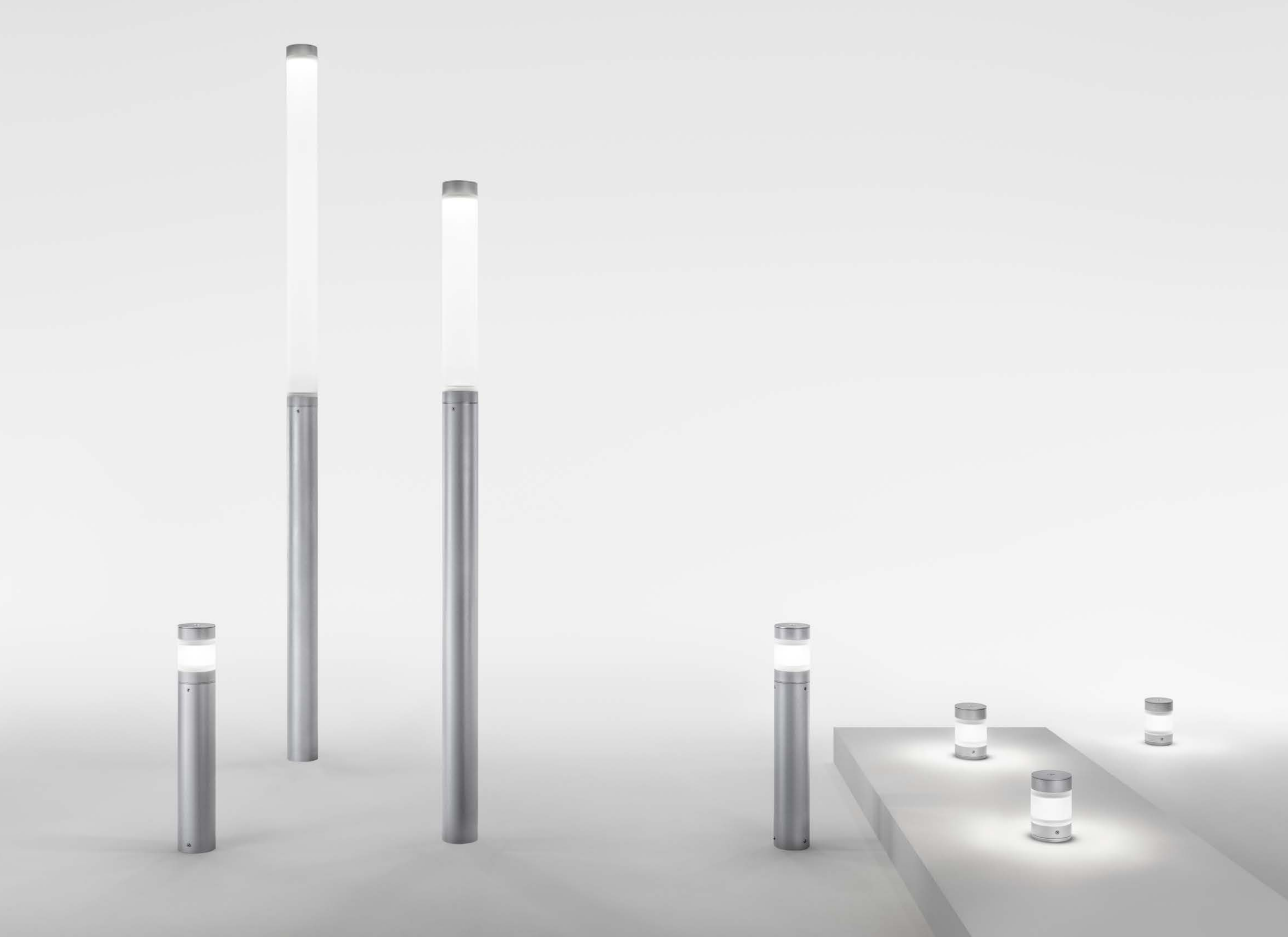

TUBE
lighting post

 


IP65
IK 10

ø 160 mm

h. 260 mm
h. 1000 mm

TUBE
urban lighting

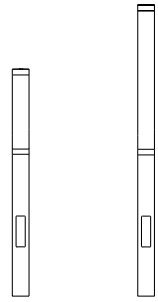

IP65
IK 10

ø 160 mm

h. 3000 mm
h. 4000 mm

on request finishes



.01 black

.02 white

standard finishes



.06 grey



.07 corten



.08 anthracite



.09 bronze

TUBE lighting post

WHITE LED

→ h. 260 mm

→ h. 1000 mm

3000K CRI>80
220-240V 0/50/60 Hz



10W | 415 lm (*) ⊕
transparent diffuser



20W | 920 lm (*) ⊞
transparent diffuser

2700K / 4000K
available on request

→ h. 260 mm

→ h. 1000 mm



10W | 610 lm (*) ⊕
sandblasted diffuser



20W | 1250 lm (*) ⊞
sandblasted diffuser

RGBW LED

→ h. 260 mm

→ h. 1000 mm

max. 500mA ⬠
4 channels +
1 channel NTC



11,5W lm (*)
sandblasted diffuser



16,5W (*)
sandblasted diffuser

(*) Real Data




Lighting data

TUBE urban lighting

WHITE LED

→ h. 3000 mm

→ h. 4000 mm

3000K CRI>80
220-240V 50/60 Hz 



42W | 2015 lm (*)
transparent diffuser



42W | 2015 lm (*)
transparent diffuser

2700K / 4000K
available on request

→ h. 3000 mm

→ h. 4000 mm



42W | 2835 lm (*)
sandblasted diffuser




42W | 2835 lm (*)
sandblasted diffuser

RGBW LED

→ h. 3000 mm

→ h. 4000 mm

max. 500mA 
4 channels +
1 channel NTC



35W lm (*)
sandblasted diffuser



35W (*)
sandblasted diffuser

(*) Real Data

Platek Srl
Registered Office: Via Paderno, 19
Head Office: Via Marrocco, 4
25050—Rodengo Saiano (BS),
Italy
P.Iva 03320290178
C.F. 03007130176

T +39 030 68 18 201
F +39 030 68 16 567
info@platek.eu
www.platek.eu

Art Direction
Gusto IDS
Platek

Graphic design
Gusto IDS
Platek

Photo
Metalli Photo Design
Ottavio Tomasini

© Platek 2020

Platek online
facebook.com/platek
twitter.com/platek
instagram.com/platek
youtube.com/platek
pinterest.it/platek

