

# SUN collection



design by  
Lundbergdesign

Platek®

SUN collection

item code: DOC\_SUN

This document is available for  
download from our website  
[www.platek.eu](http://www.platek.eu)

The data in this document are valid  
on the print date indicated above.  
Any updates are available  
on our website [www.platek.eu](http://www.platek.eu)

THANKS TO


LUNDBERGDESIGN

# SUN collection

design by  
Lundbergdesign

**Platek®**

# floodlight / pole mounted

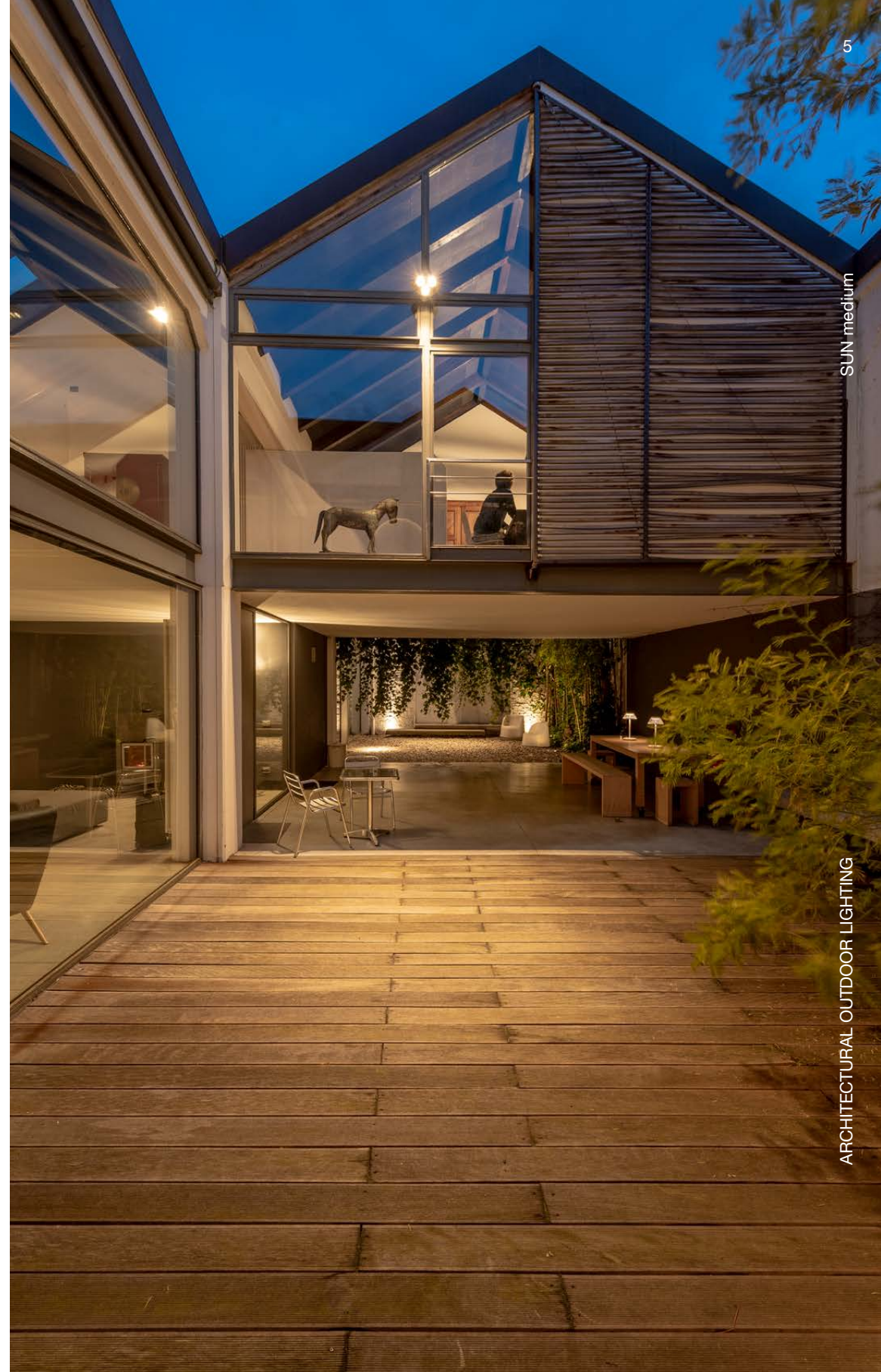



A family of floodlights designed by the Lundbergdesign Studio, in various sizes and wattages, with white or dynamic light, suitable for meeting any outdoor lighting design requirement. The design is strictly technical in feel, with decidedly captivating

aspects. Form and function are clearly identified and come together perfectly in the defined changes of surface finish and materials. Of particular note: the technological equipment is designed to show off the optics to best effect.


























SUN small  
floodlight / on pole

IP66  
IK 09

 
200 x h. 230 mm



SUN medium  
floodlight / on pole

IP66  
IK 09


270 x h. 300 mm

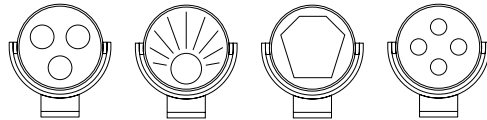

SUN large  
floodlight / on pole

IP66  
IK 09

370 x h. 400 mm

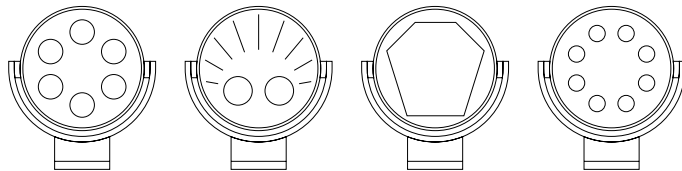

SUN small  
floodlight / floodlight on pole

WHITE COB LED

→ symmetrical

3000K CRI>80  
220-240V 0/50/60Hz ⊕



27W | 1070 lm (\*)  
spot 14°



27W | 1890 lm (\*)  
medium 26°

2700K / 4000K  
available on request



27W | 1970 lm (\*)  
large 60°

DALI dimmable

RGBW LED

→ symmetrical

max. 900mA ⚡  
4 channels +  
1 channel NTC



20W  
spot 24°



20W  
medium 40°



20W  
large 70°

standard finishes



.06 grey



.08 anthracite

 
on request finishes



.01 black



.07 corten



.02 white



.09 bronze

(\*) Real Data



## SUN medium floodlight / floodlight on pole

WHITE COB LED

→ symmetrical

3000K CRI>80  
220-240V 0/50/60Hz ⊕



40W | 2070 lm (\*)  
spot 14°



40W | 3640 lm (\*)  
medium 26°

2700K / 4000K  
available on request



40W | 3800 lm (\*)  
large 60°

DALI dimmable

→ asymmetrical

→ street optic



34W | 2630 lm (\*)  
93° x 61°



38W | 3345 lm (\*)  
150° x 55°

RGBW LED

→ symmetrical

max. 900mA ⬠  
4 channels +  
1 channel NTC



40W  
spot 24°



40W  
medium 40°



40W  
large 70°

## SUN large floodlight / floodlight on pole

WHITE COB LED

→ symmetrical

3000K CRI>80  
220-240V 0/50/60Hz ⊕



80W | 4140 lm (\*)  
spot 14°



80W | 7280 lm (\*)  
medium 26°

2700K / 4000K  
available on request



80W | 7600 lm (\*)  
large 60°

DALI dimmable

→ asymmetrical

→ street optic



79W | 5090 lm (\*)  
106° x 64°



76W | 6765 lm (\*)  
150° x 55°

RGBW LED

→ symmetrical

max. 900mA ⬠  
4 channels +  
1 channel NTC



80W  
spot 24°



80W  
medium 40°



80W  
large 70°

(\*) Real Data

(\*) Real Data

Platek Srl  
Registered Office: Via Paderno, 19  
Head Office: Via Marrocco, 4  
25050—Rodengo Saiano (BS),  
Italy  
P.Iva 03320290178  
C.F. 03007130176

T +39 030 68 18 201  
F +39 030 68 16 567  
info@platek.eu  
www.platek.eu

Art Direction  
Gusto IDS  
Platek  
  
Graphic design  
Gusto IDS  
Platek

Photo  
Metalli Photo Design  
Ottavio Tomasini

© Platek 2020

Platek online  
[facebook.com/platek](https://facebook.com/platek)  
[twitter.com/platek](https://twitter.com/platek)  
[instagram.com/platek](https://instagram.com/platek)  
[youtube.com/platek](https://youtube.com/platek)

