

# PIX collection



PIX collection

item code: DOC\_PIX

This document is available for  
download from our website  
[www.platek.eu](http://www.platek.eu)

The data in this document are valid  
on the print date indicated above.  
Any updates are available  
on our website [www.platek.eu](http://www.platek.eu)

# PIX collection



# applique downlight







The simple shapes are often the best to fit in environments, the square and the circle have always been an example of harmony and perfection. With Pix, these features

are emphasized with the application, on walls or ceilings, of a simple frame that sets the luminous flux and highlights the object even when it is off.







PIX round downlight



ARCHITECTURAL OUTDOOR LIGHTING



ARCHITECTURAL OUTDOOR LIGHTING



PIX square applique

ARCHITECTURAL OUTDOOR LIGHTING

ARCHITECTURAL OUTDOOR LIGHTING









PIX round applique


ARCHITECTURAL OUTDOOR LIGHTING

ARCHITECTURAL OUTDOOR LIGHTING








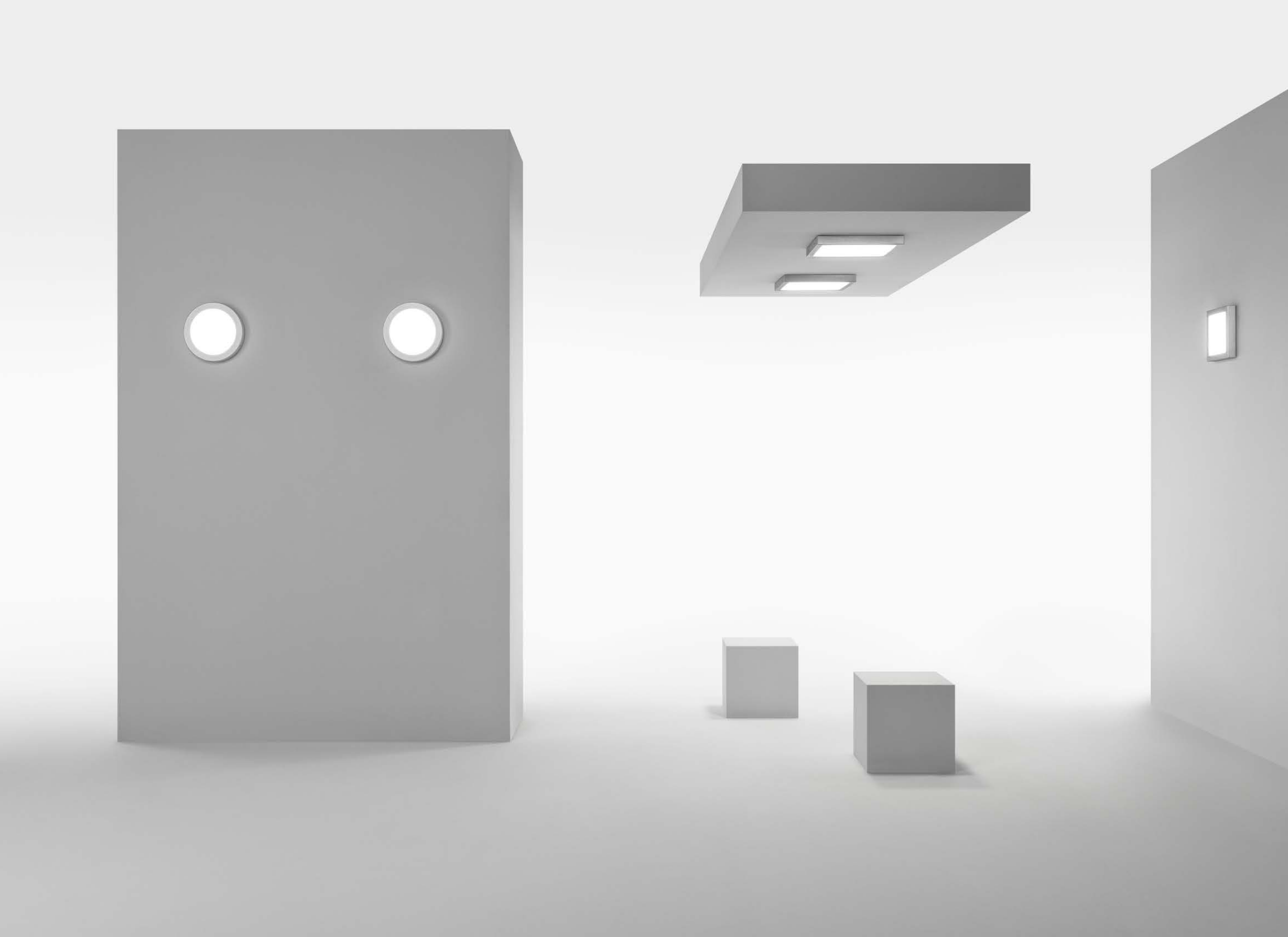



PIX round  
applique / downlight

 


IP65  
IK 07

ø 300 / 400 mm

4 mm painted  
extra-clear glass

 PIX square  
applique / downlight




IP65  
IK 07

∅ 260 / 400 mm

4 mm painted  
extra-clear glass

### standard finishes

 

.06 grey

### on request finishes



.01 black



.02 white



.08 anthracite



.07 corten



.09 bronze

## PIX applique / downlight

WHITE LED

3000K CRI>80  
220-240V 50/60 Hz ⊕

2700K / 4000K  
available on request

→ corridor function

→ round ø 300 mm



8,5W | 730 lm (\*)  
13,5W | 905 lm (\*)  
sandblasted

115°  
340 cd/klm

→ round ø 400 mm



16,5W | 1490 lm (\*)  
22W | 1860 lm (\*)  
sandblasted

115°  
340 cd/klm

→ square ∅ 260 mm



7,5W | 580 lm (\*)  
12,5W | 720 lm (\*)  
sandblasted

115°  
340 cd/klm

→ square ∅ 400 mm



17W | 1335 lm (\*)  
22W | 1670 lm (\*)  
sandblasted

115°  
340 cd/klm

WHITE LED

3000K CRI>80  
220-240V 0/50/60 Hz ⊕

2700K / 4000K  
available on request

→ square ∅ 260 mm



9,2W | 500 lm (\*)  
13,5W | 620 lm (\*)  
sandblasted

115°  
340 cd/klm

→ square ∅ 400 mm



18W | 1120 lm (\*)  
24W | 1400 lm (\*)  
sandblasted

115°  
340 cd/klm

(\*) Real Data

Platek Srl  
Registered Office: Via Paderno, 19  
Head Office: Via Marrocco, 4  
25050—Rodengo Saiano (BS),  
Italy  
P.Iva 03320290178  
C.F. 03007130176

T +39 030 68 18 201  
F +39 030 68 16 567  
marketing@platek.eu  
www.platek.eu

Art Direction  
Gusto IDS  
Platek  
  
Graphic design  
Gusto IDS  
Platek

Photo  
Edoardo Delille  
Metalli Photo Design  
Ottavio Tomasini

© Platek 2021

Platek online  
[facebook.com/platek](https://facebook.com/platek)  
[twitter.com/platek](https://twitter.com/platek)  
[instagram.com/platek](https://instagram.com/platek)  
[youtube.com/platek](https://youtube.com/platek)  
[pinterest.it/platek](https://pinterest.it/platek)



