



PLUMBING

CATALOG



A HISTORY OF EXCELLENCE

T&S Brass and Bronze Works has built a reputation for quality, service and innovation for over 75 years. Today, our commercial faucets have become the standard for many U.S. hospitals, schools, restaurants, supermarkets and public facilities.

T&S faucets are highly acclaimed throughout the industry for being well-built, long-lasting and reliable. Rigorous testing and a focus on interchangeability have helped set T&S apart from the competition.

TOP REASONS TO CHOOSE T&S BRASS

24-Hour Quick Ship

Place your order before noon for same day processing and expedited shipping. You never have to worry about downtime or finding room for inventory. We make sure your order arrives when you need it.

Outstanding Customer Service

A T&S trademark – our highly trained, friendly and knowledgeable staff answers your calls without delay. Existing customers can also access T&S through E-Store, our online ordering portal that provides convenience with ordering, tracking shipments and more. Register today at <http://register.tsbrass.com>

Custom Engineering and Modifications

Our engineers have the technical expertise and qualifications to design and build to your specific requirements. When needed, we can customize your order, so with confidence we say, "We can make it like you want it and get it to you when you need it."

Interchangeability

For more than 70 years, our products have been manufactured to work together – handles, spouts, inlets, aerators and accessories. Our interchangeable philosophy gives you exceptional flexibility and performance efficiencies that are unsurpassed. Our standardized parts allow you to carry less inventory.

Energy and Water Conserving Design

T&S understands how vital water conservation is today. We lead the way in the foodservice and plumbing industries with our extensive line of water- and energy-saving products that meet and exceed conservation requirements while not compromising performance.

East and West Coast Warehouses

Our warehouses are located on both coasts so we can serve you better and faster. Customer service representatives are available to take your calls between 8:00 a.m. EST and 5:00 p.m. PST.

Quality and Innovation

Founded on a commitment to quality and innovation, T&S Brass introduced the industry's first pre-rinse unit. Ever since that time we have set the standard for new products designed to keep up with evolving applications while cutting installation time. Our heavy-duty brass castings and cartridges have proven themselves as long-term fixture in many commercial applications. And we're a leader on product safety.

Extensive Product Line

We offer an extensive range of products for practically every industry – from plumbing and foodservice to laboratory, institutional, medical and even the pet market. You'll find T&S in restaurants, hospitals, schools and hotels around the world. Whatever your application needs, we've got you covered or we'll work with you to create the best possible solution.

Rigorous Testing

At T&S, we test every single product we manufacture. Reliability Built In™ means nothing gets past us, and you'll never have to worry about product performance.

Family Owned and Operated

Founded in 1947, T&S is a family owned and operated business committed to quality, innovation and the highest service to our customers. We manufacture products to solve real world problems and services designed to make your life simpler.

Codes and Compliances

T&S products are manufactured to the highest standards in the industry, and are certified by a wide variety of national and international organizations, such as ISO, CSA, UL, NSF, IAPMO, ASSE and the list goes on. We are committed to the safety and reliability of each fixture we make. When specific issues arise such as safe drinking water concerns* or water pressure limitations, you can trust us for solutions and products that are up to code.

*T&S products are ANSI/NSF Standard 61, Section 9 certified.





B-0892

- 4" centerset deck mount mixing faucet
- Quarter-turn compression cartridges with spring checks
- 2-7/8" swivel/rigid gooseneck
- 4" (102 mm) wrist action handles (B-WH4-NS) with color coded indexes
- 1/2" NPSM male inlets with coupling nuts
- 2.2 GPM aerator (B-0199-01)

B-0892-CR

- Same as B-0892 except with ceramic cartridges

B-0892-VF05

- Same as B-0892 except with B-0199-06-N05 vandal resistant 0.5 GPM non-aerated spray device



B-0890

- 4" centerset deck mount mixing faucet
- Quarter-turn compression cartridges with spring checks
- 4" (102 mm) wrist action handles (B-WH4-NS) with color coded indexes
- 1/2" NPSM male inlets with coupling nuts
- 2.2 GPM aerator (B-0199-03)

B-0890-CR

- Same as B-0890 except with ceramic cartridges

B-0890-VF05

- Same as B-0890 except with B-0199-08-N05 vandal resistant 0.5 GPM non-aerated spray device



B-0871

- 4" centerset deck mount mixing faucet
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- 1/2" NPSM male inlets with coupling nuts
- 2.2 GPM aerator (B-0199-03)

B-0871-CR

- Same as B-0871 except with ceramic cartridges

B-0871-VF05

- Same as B-0871 except with B-0199-08-N05 vandal resistant 0.5 GPM non-aerated spray device



B-2866-05

- 8" deck mount EasyInstall concealed widespread faucet
- 5-3/4" swivel/rigid gooseneck
- 2.2 GPM aerator (B-0199-01)
- Quarter-turn compression cartridges with spring checks
- Wrist-action handles with color coded indexes (B-WH4-NS)
- 1/2" NPT male inlets with coupling nuts

EasyInstall

B-2866-05CR

- Same as B-2866-05 except with ceramic cartridges

B-2866-05-VF05

- Same as B-2866-05 except with (B-0199-06-N05) 0.5 GPM vandal resistant non-aerated spray device

B-2866-05-LF15

- Same as B-2866-05 except with (B-0199-29) 1.6 GPM laminar flow device



B-2866-05FC15

- 8" deck mount EasyInstall concealed widespread faucet
- 5 11/16" rigid/swivel gooseneck
- 1.5 GPM flow disc
- Quarter-turn compression cartridges with spring checks
- Wrist-action handles with color coded indexes (B-WH4-NS)
- 1/2" NPT male inlets with coupling nuts

EasyInstall



B-2990-WH4-VF05

- 8" deck mount EasyInstall concealed widespread faucet
- 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05)
- Quarter-turn compression cartridges with spring checks
- Wrist-action handles with color coded indexes (B-WH4-NS)
- 1/2" NPT male inlets with coupling nuts

EasyInstall

B-2990

- Same as B-2990-WH4-VF05 except with (B-0199-03) 2.2 GPM aerator and lever handles

B-2990-BWH4CR

- Same as B-2990-WH4-VF05 except with (B-0199-03) 2.2 GPM aerator



B-2850-F05

- 8" deck mount EasyInstall concealed widespread faucet
- 5-3/4" rigid/swivel gooseneck
- 0.5 GPM non-aerated flow device (B-0199-02-N05)
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- 1/2" NPT male inlets with coupling nuts

EasyInstall

B-2850

- Same as B-2850-F05 except with (B-0199-01) 2.2 GPM aerator



B-2865-05-133XA

- Adjustable centers concealed deck mount mixing faucet
- 5-3/4" rigid/swivel gooseneck
- 2.2 GPM aerator(B-0199-01)
- Quarter-turn compression cartridges with spring checks
- Wrist-action handles with color coded indexes (B-WH4-NS)
- 1/2" NPT male inlets with coupling nuts



BP-0300-CR4XP15

- Single hole deck mount mixing faucet
- 1.5 GPM flow control device pre-installed in swivel gooseneck (133XP-F15)
- 5 11/16" swivel/rigid gooseneck with plain end outlet
- Wrist-action handles with color coded indexes (B-WH4-NS)
- Quarter-turn ceramic cartridges with check valves
- 19" flexible stainless steel supply hoses with 3/8" compression connections



B-2866-04

- 8" deck-mount EasyInstall concealed widespread faucet
- 5-13/16" swivel/rigid gooseneck
- Rosespray 2.2 GPM outlet (B-0103-01)
- Quarter-turn compression cartridges
- Wrist-action handles with color coded indexes (B-WH4-NS)
- 1/2" NPT male inlets with coupling nuts

EasyInstall

B-2866-04-F12

- Same as B-2866-04 except with a 1.2 GPM Rosespray (B-0103-FD12)

T&S BRASS PLUMBING PRODUCTS BEDPAN WASHERS



B-0676

- Wall mount double pedal valve with polished chrome plated brass body
- Pedal valve with 1/2" NPT female angled loose key stops
- Volume control valve with 3/8" NPT female outlet on pedal valve
- Wall hook outlet with 3/8" NPT female inlet
- Elevated vacuum breaker with 3/8" female inlet and outlet
- 68" PVC hose with extended spray nozzle with 2.2 GPM rosespray

**B-0678**

- Wall mount bed pan washer with polished chrome plated brass body
- 3/8" atmospheric vacuum breaker
- 68" PVC hose with self-closing valve and extended spray nozzle with 2.2 GPM ro-spray
- Volume control valve with 4-arm handle and blue color coded index
- compression cartridge
- 1/2" NPT female angled loose key stop with tree handle

**B-0655-BSTP**

- 8" wall mount mixing faucet with polished chrome plated brass body
- Adjustable centers from 7 3/4" to 8 1/4"
- Built-in service stops
- Lever handles with color coded indexes
- Lower support rod
- Quarter-turn compression cartridges with spring checks
- 1/2" NPT eccentric female inlets with 2" flanges & 4" extensions

**B-0502**

- Floor mount double pedal valve with metering cartridges
- Hot and cold pedals
- Inlets on 2-1/2" centers
- 1" (25 mm) from floor to center of inlets
- 1/2" NPT female inlets and outlets
- Furnished with two (2) wood mounting screws
- Pedals flip up for easy floor cleaning

**B-0520**

- Deck-mount swivel/rigid dummy gooseneck (133X)
- B-PT stream regulator outlet
- Deck flange with 1/2" NPSM male inlet
- Includes tailpiece and nut for 1/4" NPT connection

**B-0537**

- Wall-mount rigid dummy gooseneck
- 2" adjustable wall flange
- 2.2 GPM aerator (B-0199-02)
- 1/2" NPT female inlet



B-0712

- Single hole, single temperature deck-mount faucet
- 2.2 GPM aerator (B-0199-03)
- Metering cartridge with adjustable timed flow
- Blank push button cap with vandal-resistant screw
- 1/2" NPSM male inlet
- Includes tailpiece and nut for 1/4" NPT connection

B-0712-VF05

- Same as B-0712 except with (B-0199-07-N05) 0.5 GPM aerator

B-0712-VF05-4DP

- Same as B-0712-VF05 except with 4" centerline deck plate



B-0831

- 4" centerset deck mount mixing faucet
- 2.2 GPM aerator (B-0199-03)
- Metering cartridges with adjustable timed flow (10 to 30 seconds)
- 1/2" NPSM male inlets

B-0831-VF05

- Same as B-0831 except with (B-0199-08-N05) 0.5 GPM aerator



B-0831-PA

- 4" centerset deck mount mixing faucet
- 2.2 GPM aerator (B-0199-03)
- Metering cartridges with adjustable timed flow (10 to 30 seconds)
- 1/2" NPSM male inlets
- Pivot action (hot & cold) handles with vandal resistant screw



B-0831-WA

- 4" centerset deck mount mixing faucet
- 2.2 GPM aerator (B-0199-03)
- Metering cartridges with adjustable timed flow (10 to 30 seconds)
- 1/2" NPSM male inlets
- 4" wrist action handles with color coded indexes (B-WH4-NS)



B-0805

- Single hole single temperature deck mount faucet
- 2.2 GPM aerator (B-0199-02)
- Metering cartridge with adjustable timed flow (10 to 30 seconds)
- Blank push button cap with vandal resistant screw
- 1/2" NPSM male inlet

B-0805-VF05

- Same as B-0805 except with a B-0199-07-N05 0.5 GPM aerator



B-0800

- Single hole single temperature wall mount faucet
- 2.2 GPM Rosespray outlet (B-0103)
- Metering cartridges with adjustable timed flow (10 to 30 seconds)
- Blank push button cap with vandal-resistant screw
- 1/2" NPT female inlet

B-0800-PA

- Same as B-0800 except with pivot action metering handle with vandal-resistant screw



BP-0723

- Single hole, single temperature deck-mount faucet with polished chrome finish
- Vandal resistant 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- Metering cartridge adjustable from 10 to 30 seconds
- Push button cap
- 1/2" NPSM male inlet
- 24" flexible stainless steel supply hose with 3/8" compression connection inlet



B-2991

- 8" EasyInstall concealed deck mount mixing faucet
- 2.2 GPM aerator (B-0199-03)
- Metering cartridges with adjustable timed flow (10 to 30 seconds)
- Push button caps with vandal resistant screws
- 1/2" NPSM male inlets with coupling nuts

EasyInstall



B-0834

- 4" centerset deck mount mixing faucet
- 2 7/8" swivel gooseneck
- 2.2 GPM aerator (B-0199-01)
- Metering cartridges with adjustable timed flow (10 to 30 seconds)
- Push button caps with vandal resistant screws
- 1/2" NPSM male inlets with coupling nuts



B-0712-WA

- Single hole, single temperature cast spout deck mount faucet
- 2.2 GPM aerator (B-0199-03)
- Metering cartridges with adjustable timed flow (10 to 30 seconds)
- Wrist action handle with color coded index
- 1/2" NPSM male inlets with coupling nuts



B-2711

- 4" centerset deck-mount faucet
- 2.2 GPM aerator (B-0199-04)
- Ceramic cartridge with adjustable temperature limit stop
- Single lever handle with color coded index
- 1/2" NPSM male inlets with coupling nuts

B-2711-VF05

- Same as B-2711 except with (B-0199-09-N05) 0.5 GPM aerator

B-2710-VF05

- Same as B-2711 except with (B-0199-09-N05) 0.5 GPM aerator and includes a pop-up drain



B-2701

- Single hole deck-mount faucet
- 2.2 GPM aerator (B-0199-04)
- Ceramic cartridge with adjustable temperature limit stop (013111-45)
- Single lever handle with color coded index
- 16" flexible stainless steel hoses, 3/8" O.D. compression fittings

B-2701-VF05

- Same as B-2701 except with 0.5 GPM aerator (B-0199-09-N05)

B-2703-VF05

- Same as B-2701 except with 0.5 GPM aerator (B-0199-09-N05) and 4" deck plate



B-2731

- Deck mount single lever faucet with integral 9" swivel spout and 10" deck plate
- 2.2 GPM aerator (B-0199-04)
- Ceramic cartridge with adjustable temperature limit stop (013080-45)
- 16" flexible stainless steel hoses, 3/8" O.D. compression fittings

B-2731-VF05

- Same as B-2731 except with vandal resistant 0.5 GPM non-aerated spray device (B-0199-09-N05)

B-2730

- Same as B-2731 except with side spray with 4' hose and hose guide



B-2742

- Single lever side-mount base faucet (B-2740)
- Remote "On-Off" control base
- 5-3/4" swivel gooseneck assembly
- Ceramic cartridge with adjustable temperature limit stop
- (2) 16" flexible stainless steel hoses, 3/8" O.D. compression fittings

B-2743

- Same as B-2742 except with side spray with 4' hose and hose guide



B-1141-XSCR4V15

- 4" deck mount mixing faucet
- 1.5 GPM vandal resistant aerator (B-0199-06-WS)
- 5 3/4" swivel/rigid gooseneck
- 4" wrist action handles with color coded indexes and vandal resistant screws (B-WH4-NS)
- Quarter-turn ceramic cartridges with check valves
- Chrome plated escutcheon
- 1/2" NPSM extended male inlets
- Tailpieces and nuts for 1/4" NPT male connections

B-1141-XS

- Same as B-1141-XSCR4V15 except with 2.2 GPM aerator (B-0199-01)



B-1142-04XS-F12

- 8" deck mount mixing faucet
- 1.2 GPM vandal resistant aerator (B-0199-01-F12)
- 5 3/4" swivel/rigid gooseneck
- 4" wrist action handles with color coded indexes (B-WH4)
- Quarter-turn compression cartridges with spring checks
- Chrome plated escutcheon
- 1/2" NPSM extended male inlets
- Tailpieces and nuts for 1/4" NPT male connections

B-1142-XS

- Same as B-1142-04XS-F12 except with 2.2 GPM aerator (B-0199-01)



B-1110-XS

- 4" deck mount mixing faucet
- 2.2 GPM aerator (B-0199-01)
- 6" swing nozzle
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks
- Chrome plated escutcheons
- 1/2" NPSM extended male inlets
- Tailpieces and nuts for 1/4" NPT male connections

B-1110-XS-WH4

- Same as B-1110-XS except with 4" wrist action handles (B-WH4-NS)



B-1172-07-WH4

- 8" deck mount mixing faucet
- 2.2 GPM aerator (B-0199-01)
- 5 3/4" swivel gooseneck
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks
- Chrome plated escutcheons
- 1/2" NPT male inlets
- Tailpieces and nuts for 1/4" NPT male connections



B-0665-BSTR

- 8" wall-mount mixing faucet
- Rough chrome plated finish
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- Built-in service stops
- Vacuum breaker spout with 3/4" garden hose male thread and pail hook
- Upper wall support with mounting screws
- 1/2" NPT female eccentric flanged inlets (00AA)

B-0665-BSTP

- Same as B-0665-BSTR except polished chrome finish



B-0667-RGH

- Wall mount mixing faucet
- Adjustable centers from 2 1/4" to 8 1/4" above or below centerline
- Rough chrome plated finish
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- Vacuum breaker spout with 3/4" garden hose male thread and pail hook
- Upper support rod with mounting screws
- 1/2" NPT female adjustable arm inlets with 2" flanges and built-in service stops



B-0674-RGH

- 8" wall-mount mixing faucet
- Rough chrome plated finish
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- Vacuum breaker spout with 3/4" garden hose male thread and pail hook
- 1/2" NPT female inlets



B-0706

- Single hole, single temperature wall-mount sill faucet
- Four-arm handle with color coded index
- Fast self-closing cartridge
- 2" diameter flange
- 1/2" NPT female inlets



B-0737-POL

- Single hole, wall mount faucet with polished chrome plated brass body
- Compression cartridge
- Loose key style shutoff, controlled by tee handle (included) or screwdriver
- Vacuum breaker with male garden hose outlet
- 3/4" NPT female inlet with 2" flange



B-2360

- Polished chrome plated bubbler
- Flexible mouth guard
- Fast self-closing cartridge with lever handle
- Hidden flow control, with adjustable outlet flow
- 1/2" NPSM male inlet and coupling nut

B-2360-01

- Same as B-2360 except with adjustable push button metering cap (10 to 30 seconds)



EC-2360

- Single hole, deck mount electronic sensor bubbler
- Polished chrome plated bubbler
- Flexible mouth guard
- AC/DC control module with internal flow control switches
- Hidden flow control, with adjustable outlet flow
- 18" flexible stainless steel supply hose with 3/8" compression connection
- Low battery LED indicator light
- Optional auto flush feature flows water for 30 seconds after every 12 inactive hours
- Water resistant control module with internal flow control switches for adjusting auto time out & shut off delay settings



B-1210

- 1/2" NPT male inlet
- 8" high deck mount glass filler
- Dark blue push back arm
- Instantaneous shut-off
- Pedestal with adjustable 2" flange
- Torx wrench adjustable flow outlet (wrench included)



EC-1210-08

- 1.5 GPM vandal resistant laminar device with anti-microbial coating (B-0199-06-LF15A)
- 18" flexible stainless steel supply hose with 3/8" compression connection
- 4 5/8" high arc rigid nozzle
- 8" high single hole deck mount glass filler with polished chrome plated brass body
- Low battery LED indicator light
- Optional auto flush feature flows water for 30 seconds after every 12 inactive hours
- Plug in AC transformer or (4) AA battery (DC) power options
- Water resistant control module with internal flow control switches for adjusting auto time out & shut off delay settings



BL-5700-08

- Single hole deck mount laboratory mixing faucet
- Swivel/rigid vacuum breaker nozzle with serrated hose tip with 0.5 GPM flow control
- 18" flexible stainless steel supply hoses with 1/2" NPSM / 5/8" compression connections
- Compression cartridges
- Four-arm handles with color coded indexes
- Mounting gasket included
- Quarter-turn compression cartridges with spring checks to prevent cross flow of water



BL-5705-01

- Single hole single temperature deck mount faucet
- 5-7/8" swivel/rigid gooseneck
- Serrated tip outlet
- Quarter-turn compression cartridge with spring check
- 4-arm handle with green index
- 1/2" NPSM male inlet
- Optional tailpiece and nut for 1/4" NPT male connection



BL-5700-04

- Single hole deck mount mixing faucet
- 5-5/8" swivel/rigid gooseneck with 2.2 GPM aerator (B-0199-01)
- Quarter-turn compression cartridges with spring checks
- 4-arm handles with color coded indexes
- Includes mounting gasket
- 18" flexible stainless steel supply hoses with 1/2" NPSM / 5/8" compression connections



BL-6000-02

- (2) hose cocks with gas indexes
- 3/8" NPT male gas and water inlets
- Rigid gooseneck with serrated hose tip
- Four-arm handle with green cold water index



BL-9505-01

- Single hole single temperature deck mount PVC faucet
- 6" rigid gooseneck with serrated hose tip
- 3/8" NPT female inlet
- All PVC for use with distilled water
- Black rotary handle with color coded index (Stamped "DW" for distilled water)



BL-9510-01

- Single hole single temperature wall mount PVC faucet
- Rigid gooseneck with serrated hose tip
- 3/8" NPT female inlet
- All PVC for use with distilled water
- Black rotary handle with color coded index (Stamped "DW" for distilled water)



BL-5850-01TL

- Single hole, tin-lined single temperature deck mount faucet
- 5-7/8" swivel/rigid gooseneck with serrated tip outlet
- Fast self-closing cartridge
- 4-arm handle with white "DW" (distilled water) index
- 1/2" NPSM male inlet
- Optional tailpiece and nut for 1/4" NPT male connection
- Tin-lined for use with pure water
- Designed for use with reversed osmosis and distilled water



BL-5710-01A-TL

- Single hole, single temperature tin-lined wall mount faucet
- 5-3/4" swivel/rigid gooseneck
- 2.2 GPM aerator (B-0199-01)
- Quarter-turn compression cartridge with spring check
- 4-arm handle with color coded index
- 1/2" NPT female inlet with 2" flange
- Tin-lined for use with pure water



BL-5710-01A-TL

- Wall mount turret
- 5-5/8" swivel/rigid gooseneck with serrated tip outlet
- For use with remote valves
- 3/8" NPT female inlet



BL-4000-01

- Ball valve hose cock
- CSA approved for fuel gases up to 0.5 psi max.
- 125 PSIG max. for air
- Vacuum: 30 inches of Mercury MAs
- Natural gas pressure: 0.5 PSIG max
- 3/8" NPT male inlet
- Serrated hose tip
- Snap-in indexes included; gas, air or vacuum

Note: Not for water, steam or oxygen. For oxygen and specialty gases use BL-4010-01



BL-4010-01

- 3/8" NPT male inlet
- Approved for fuel gases up to 0.5 psi max.
- Serrated hose tip
- Snap-in indexes included; gas, air or vacuum
- For use with oxygen and hydrogen and other special gases up to 80 PSIG
- Fuel Gas - 0.5 PSI max
- Other gases including air - 80 PSI max. vacuum - 30 inches of mercury max.

Note: Not for water or steam



BL-4200-0

- Two hose cocks at 90°
- 3/8" NPT female inlet
- Snap-in indexes included; gas, air or vacuum
- Diameter 2-3/16"; height 3-5/8"
- 0.5 PSIG max. for natural gas
- 125 PSIG max. air pressure
- Vacuum – 30 inches of mercury max

Note: For oxygen and specialty gases use BL-4210-01



BL-4200-01

- Ball valve hose cock
- 3/8" NPT female inlet
- Snap-in indexes included; gas, air or vacuum
- 0.5 PSIG max. for natural gas

Note: For oxygen and specialty gases use BL-4010-01

LAKECREST™

BY T&S

Beauty without compromise

Sophisticated design blends with commercial durability in the elegant LakeCrest line by T&S Brass. These seven stylish fixture designs bring a touch of refinement and legendary reliability to busy, modern facilities.

Select LakeCrest models are also available in these finishes to optimize your design:



Polished Chrome



Brushed Nickel
(-BN)



Matte Black
(-MB)

Most models come standard with the vandal resistant 0.5 GPM concealed non-aerated spray device (V05).

Optional outlet devices available upon request:

- Vandal resistant 0.35 GPM concealed non-aerated spray device (V035 - CALGreen)
- Vandal resistant 1.0 GPM concealed aerator (V10 – California CEC Title 20)
- Vandal resistant 1.5 GPM concealed aerator (V15 – EPA WaterSense)
- Vandal resistant 1.5 GPM concealed laminar flow device (VL15 – Healthcare/Medical)



BP-0723

- Single hole, single temperature deck-mount faucet with polished chrome finish
- Vandal resistant 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- Metering cartridge adjustable from 10 to 30 seconds
- Push button cap
- 1/2" NPSM male inlet
- 24" flexible stainless steel supply hose with 3/8" compression connection inlet

BP-0723-4DP

- Same as BP-0723 but with 6" deck plate designed to be used with 4" hole centers



BP-2704

- Deck mount single lever faucet with polished chrome finish
- Vandal resistant 0.5 GPM non-aerated spray device (B-0199-M21-V05)
- Quarter-turn ceramic cartridge with check valves
- 19" flexible stainless steel supply hose with 3/8" O.D. compression connection
- Can be paired with T&S universal chrome plated deckplate

BP-2704-BN

- Same as BP-2704 but with brushed nickel finish

BP-2704-MB

- Same as BP-2704 but with matte black finish



BP-2712

- 4" centerset deck mount single lever faucet with polished chrome finish
- Vandal resistant 0.5 GPM non-aerated spray device (B-0199-M21-V05)
- Quarter-turn ceramic cartridges with check valves
- 19" flexible stainless steel supply hose with 3/8" O.D. compression connection

BP-2712-BN

- Same as BP-2712 but with brushed nickel finish

BP-2712-MB

- Same as BP-2712 but with matte black finish



BP-2995

Easy Install

- 8" EasyInstall concealed widespread faucet with polished chrome finish
- Vandal resistant 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- Quarter-turn ceramic cartridges with check valves
- Lever handles with color coded indexes
- 1/2" NPSM male inlet
- 24" flexible stainless steel supply hose with 3/8" O.D. compression connection



S-2770

- Semi-pro brushed stainless steel deck mount single lever faucet
- Vandal resistant 1.5 GPM hidden aerator and 1.5 GPM concentric spray device with magnetic holder
- Quarter-turn ceramic cartridge
- 21" flexible stainless steel hose
- 19" flexible stainless steel supply hoses with 3/8" compression connection
- Easy toggle switches between aerator and sprayer

WAVECREST™

BY T&S

Hands-free elegance

Contemporary style meets durability in the touchless WaveCrest line by T&S Brass and Bronze Works, a leading commercial-grade plumbing manufacturer with a history of unmatched reliability and durability for 75 years.

Every WaveCrest model is available in three finishes to optimize your design:



Polished Chrome



Brushed Nickel
(-BN)



Matte Black
(-MB)

Most models come standard with the vandal resistant 0.5 GPM concealed non-aerated spray device (V05).
Optional outlet devices available upon request:

- Vandal resistant 0.35 GPM concealed non-aerated spray device (V035 - CALGreen)
 - Vandal resistant 1.0 GPM concealed aerator (V10 – California CEC Title 20)
 - Vandal resistant 1.5 GPM concealed aerator (V15 – EPA WaterSense)
- Vandal resistant 1.5 GPM concealed laminar flow device (VL15 – Healthcare/Medical)



ECW-3150

- Single hole deck mount electronic faucet with gooseneck spout with polished chrome finish
- 0.5 GPM hidden non-aerated spray device (B-0199-M16-V05)
- AC/DC control module with internal flow control setting switches
- Temperature control mixing valve with integral check valves
- (2) 18" 3/8" compression x 1/2" NPSM flexible stainless steel supply hoses
- Hydrogenerator models available

ECW-3150-HG

- Same as ECW-3150 but includes hydrogenerator

ECW-3150-BN

- Same as ECW-3150 but with brushed nickel finish

ECW-3150-BN-HG

- Same as ECW-3150 but with brushed nickel finish and includes hydrogenerator

ECW-3150-MB

- Same as ECW-3150 but with matte black finish

ECW-3150-MB-HG

- Same as ECW-3150 but with matte black finish and includes hydrogenerator



ECW-3152

- Single hole deck mount electronic faucet with cast spout and polished chrome finish
- 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- AC/DC control module with internal flow control setting switches
- Temperature control mixing valve with integral check valves
- (2) 18" 3/8" compression x 1/2" NPSM flexible stainless steel supply hoses
- Hydrogenerator models available
- Matching soap dispensers available

ECW-3152-HG

- Same as ECW-3152 but includes hydrogenerator

ECW-3152-BN

- Same as ECW-3152 but with brushed nickel finish

ECW-3152-BN-HG

- Same as ECW-3152 but with brushed nickel finish and no logo

ECW-3152-MB

- Same as ECW-3152 but with matte black finish



ECW-3153

- Single hole 4" deck mount electronic faucet with cast spout and polished chrome finish
- 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- AC/DC control module with internal flow control setting switches
- Temperature control mixing valve with integral check valves
- Hydrogenerator models available
- (2) 18" 3/8" compression x 1/2" NPSM flexible stainless steel supply hoses
- Matching soap dispensers available

ECW-3153-HG

- Same as ECW-3153 but includes hydrogenerator

ECW-3153-BN

- Same as ECW-3153 but with brushed nickel finish

ECW-3153-BN-HG

- Same as ECW-3153 but with brushed nickel finish and hydrogenerator

ECW-3153-MB

- Same as ECW-3153 but with matte black finish



ECW-3158

- Single hole deck mount electronic faucet with compact cast spout with polished chrome finish
- 0.5 GPM hidden non-aerated spray device (B-0199-M16-V05)
- AC/DC control module with internal flow control
- Temperature control mixing valve with integral check valves
- (2) 18" 3/8" compression x 1/2" NPSM flexible stainless steel supply hoses
- Hydrogenerator models available

ECW-3158-HG

- Same as ECW-3158 but includes hydrogenerator

ECW-3158-BN

- Same as ECW-3158 but with brushed nickel finish

ECW-3158-BN-HG

- Same as ECW-3158 but with brushed nickel finish and includes hydrogenerator

ECW-3158-MB

- Same as ECW-3158 but with matte black finish



ECW-3162

- Single hole deck mount electronic faucet with cast spout with polished chrome finish
- 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- AC/DC control module with internal flow control setting switches
- 6-5/16" (161 mm) overall height
- Temperature control mixing valve with integral check valves
- (2) 18" 3/8" compression x 1/2" NPSM flexible stainless steel supply hoses
- Hydrogenerator model available
- Matching soap dispensers available

ECW-3162-HG

- Same as ECW-3162 but includes hydrogenerator

ECW-3162-BN

- Same as ECW-3162 but with brushed nickel finish

ECW-3162-MB

- Same as ECW-3162 but with matte black finish



ECW-3163

- Single hole 4" deck mount electronic faucet with cast spout with polished chrome finish
- 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- AC/DC control module with internal flow control setting switches
- 6-5/16" (161 mm) overall height
- Temperature control mixing valve with integral check valves
- (2) 18" 3/8" compression x 1/2" NPSM flexible stainless steel supply hoses
- Hydrogenerator model available
- Matching soap dispensers available

ECW-3163-HG

- Same as ECW-3163 but includes hydrogenerator

ECW-3163-BN

- Same as ECW-3163 but with brushed nickel finish

ECW-3163-BN-HG

- Same as ECW-3163 but with brushed nickel finish and includes hydrogenerator

ECW-3163-MB

- Same as ECW-3163 but with matte black finish



ECW-3172

- Single hole 4" deck mount electronic faucet with cast spout with polished chrome finish
- 0.5 GPM hidden non-aerated spray device (B-0199-M21-V05)
- AC/DC control module with internal flow control setting switches
- Temperature control mixing valve with integral check valves
- (2) 18" 3/8" compression x 1/2" NPSM flexible stainless steel supply hoses
- Hydrogenerator model available

ECW-3172-HG

- Same as ECW-3172 but includes hydrogenerator

ECW-3172-BN

- Same as ECW-3172 but with brushed nickel finish

ECW-3172-BN-HG

- Same as ECW-3172 but with brushed nickel finish and includes hydrogenerator

ECW-3172-MB

- Same as ECW-3172 but with matte black finish



SENSOR FAUCETS

- Chrome plated brass
- Troubleshooting LED indicator lights
- Scratch-resistant sensor lens
- Filtered solenoid valve with serviceable strainer filter
- Modular quick-release sensor connections (below deck models only)
- Optional autoflush feature flows water for 30 seconds after every 12 inactive hours
- Low battery indicator light
- Pre-assembled with appropriate mounting hardware included
- Vandal-resistant outlets
- Check valves for cross-flow prevention in all models
- Requires no sealants for easy installation
- Adjustable automatic time-out feature



EC-3100

- Single hole deck mount chrome plated
- Rigid gooseneck
- 2.2 GPM vandal resistant aerator (B-0199-06)
- Mechanical temperature mixing valve with integral check valves
- AC/DC control module
- (2) 18" flex. supply hoses / 3/8" compression fittings

EC-3100-LF22

- Same as EC-3100 but with 2.2 GPM vandal resistant laminar flow device (B-0199-21-VRF)

EC-3100-SMT4V05

- Same as EC-3100 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-06-N05) and includes EC-SMT above deck side-mount adjustable thermostatic mixing valve and 4" deckplate

EC-3100-VF05

- Same as EC-3100 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-06-N05)

EC-3100-5XP15T4

- Same as EC-3100 but with 1.5 GPM plain end spout (133X-F15)



EC-3100-LF22-SB

- Single hole deck mount chrome plated
- Rigid surgical bend gooseneck (B-0199-21-VRF)
- Mechanical temperature mixing valve with integral check valves
- AC/DC control module
- Adjustable automatic time-out feature
- 2.2 GPM vandal-resistant laminar flow device



EC-3101

- Wall mount chrome plated electronic faucet
- 2.2 GPM vandal resistant aerator
- Rigid gooseneck
- Mechanical temperature mixing valve with integral check valves
- AC/DC control module
- (2) 18" flex. supply hoses with 3/8" compression fittings

EC-3101-HG

- Same as EC-3101 but includes hydrogenerator

EC-3101TMVHGF10

- Same as EC-3101 but with 1.0 GPM vandal resistant aerator (B-0199-06-F10) and includes hydrogenerator and EC-TMV thermostatic temperature mixing valve with integral check valves

EC-3101-VF05

- Same as EC-3101 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-06-N05)



EC-3102

- Single hole deck mount chrome plated electronic faucet with integral spout
- 2.2 GPM vandal resistant aerator (B-0199-08)
- Mechanical temperature mixing valve with integral check valves
- AC/DC control module
- (2) 18" flex. supply hoses with 3/8" compression fittings

EC-3102-VF05

- Same as EC-3102 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05)

EC-3102-VF15

- Same as EC-3102 but with 1.5 GPM vandal resistant aerator (B-0199-08-WS)



EC-3103

- 4" deck mount chrome plated electronic faucet with cast spout
- 2.2 GPM vandal resistant aerator (B-0199-08)
- Mechanical temperature mixing valve with integral check valves
- AC/DC control module
- (2) 18" flex. supply hoses / 3/8" compression fittings

EC-3103-VF05

- Same as EC-3103 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05)

EC-3103-VF5-TMV

- Same as EC-3103 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05) and includes EC-TMV thermostatic temperature mixing valve with integral check valves



EC-3104

- 4" centerset (2 hole) deck mount electronic faucet with cast spout
- 2.2 GPM vandal resistant aerator (B-0199-08)
- AC/DC control module (electric plug-in and battery)
- (2) 18" flex. supply hoses / 3/8" compression fittings
- Mechanical temperature mixing valve with integral check valves
- Designed for 4" c/c two-hole installations

EC-3104-VF05

- Same as EC-3104 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05)



EC-3105

- 4" (2 hole) wall mount electronic sensor faucet
- 2.2 GPM vandal resistant aerator (B-0199-08)
- Designed for 4" c/c two-hole installations
- AC/DC control module (electric plug-in and battery)
- (2) 18" flexible supply hoses / 3/8" compression fittings
- Mechanical temperature mixing valve with integral check valves

EC-3105-HG

- Same as EC-3105 but with included hydrogenerator



EC-3107

- 4" c/c deck mount faucet with polished chrome plated brass body
- 4 1/8" rigid gooseneck
- 2.2 GPM vandal resistant aerator (B-0199-06)
- AC/DC control module (electric plug-in and battery)
- (2) 18" flexible supply hoses / 3/8" compression fittings
- Mechanical temperature mixing valve with integral check valves
- Designed for 4" c/c two-hole installations

EC-3107-LF22

- Same as EC-3107 but with 2.2 GPM vandal resistant laminar flow device (B-0199-21-VRF)

EC-3107-VF05

- Same as EC-3107 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-06-N05)

EC-3107-VF12

- Same as EC-3107 but with 1.2 GPM vandal resistant aerator (B-0199-06-F12)



EC-3113-VF05

- Ligature resistant 4" centerset deck mount faucet
- 0.5 GPM vadal resistant hidden non-aerated spray device (B-0199-M21-V05)
- AC/DC control module
- Temperature control mixing valve with integral check valves
- (2) 18" flex. supply hoses / 3/8" compression fittings
- Accepted by New York State Office of Mental Health

EC-3113-VL10

- Same as EC-3113-VF05 but with 1.0 GPM vandal resistant laminar flow device (B-0199-M21-VL10)

EC-3113-VL15

- Same as EC-3113-VF05 but with 1.5 GPM vandal resistant laminar flow device (B-0199-M21-VL15)



EC-3130

- Single hole deck mount chrome plated electronic faucet
- 2.2 GPM vandal resistant aerator (B-0199-06)
- Above deck electronics for easy control, installation and maintenance
- 5-7/17" swivel/rigid gooseneck
- Temperature mixing handle (optional plug included to replace handle when temperature is preset)
- Manual bypass operation
- 19" flexible supply hose / 3/8" compression inlets

EC-3130-ST-VF05

- Same as EC-3130 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-06-N05)

EC-3130-XP-F15

- Same as EC-3130 but with 1.5 GPM plain end spout

EC-3130-4DP

- Same as EC-3130 but with 4" deck plate



EC-3132

- Single hole deck mount chrome plated electronic faucet with cast spout
- 2.2 GPM vandal resistant aerator (B-0199-08)
- Above deck electronics for easy control, installation and maintenance
- Above deck temperature mixing lever handle
- Optional body plug replaces handle when temperature is preset
- 19" flexible supply hose / 3/8" compression inlets

EC-3132-ST-VF05

- Same as EC-3132 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05) and single temperature (lever handle replaced by plug)

EC-3132-VF05

- Same as EC-3132 but with 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05)



EC-3142-ST-VF05

- Single hole deck mount chrome plated electronic faucet with cast spout
- 0.5 GPM vandal resistant non-aerated spray device (B-0199-08-N05)
- Above deck electronics for easy control, installation and maintenance
- Single temperature faucet
- 19" flexible supply hose / 3/8" compression inlets

EC-3142

- Same as EC-3142-ST-VF05 but with 2.2 GPM vandal resistant aerator (B-0199-08) and temperature mixing lever handle

EC-3142-VF05

- Same as EC-3142-ST-VF05 but with temperature mixing lever handle



EC-SMT

- Above deck thermostatic mixing valve with brass body
- Vandal resistant locking temperature adjustment knob
- Integral check valves with filter screens in hot and cold inlets
- 1/2" NPSM male connections



EC-TMV

- Thermostatic mixing valve with brass body
- Vandal resistant locking temperature adjustment knob
- Integral check valves with filter screens in hot and cold inlets
- 1/2" NPSM male connections



DECKPLATES

- Forged brass chrome plated deckplates
- Available for use with single hole faucets
- To add a deckplate to a faucet order:
 - 4" Centers (013433-40)
 - 8" Centers (013434-40)



EC-HYDROGEN

- Hydrogenerator power supply accessory package
- 1/2" NPSM male inlet and outlet
- Minimal flow rate of 1.0 GPM required to activate unit



EC-HYDROGEN-LF

- Low flow hydrogenerator power supply accessory package
- 1/2" NPSM male inlet and outlet
- For use with flow rates from 0.5 to 1.0 GPM



EC-HARDWIRE

- Hardwire AC transformer power supply
- For use with 4 11/16" square x 2 1/2" deep conduit box
- Powers up to 8 CheckPoint faucets



EC-EASYWIRE

- Plug-in AC transformer power supply with 76" power cord
- Powers up to 8 CheckPoint faucets
- For use with EC-EASYWIRE4CC and EC-EASYWIRE5EXT






Pictured:
5EF-1D-WG-VF05



equip Electronic Sensor Faucet Series

- Deck and wall mount models available
- AC or DC powered control module
- Temperature control mixing valve with integral check valves
- (2) 18" flexible supply hoses with 3/8" compression connections
- Vandal resistant outlets
- Low battery indicator light



		OUTLET	GALLONS PER MINUTE	DESCRIPTION
	5EF-1D-DG	B-0199-06 vandal resistant aerator	2.2	Single hole deck mount; rigid gooseneck
	5EF-1D-DG-VF05	B-0199-06-N05 vandal resistant non-aerated spray device	0.5	Single hole deck mount; rigid gooseneck
	5EF-1D-DS	B-0199-09 vandal resistant aerator	2.2	Single hole deck mount; cast spout
	5EF-1D-DS-VF05	B-0199-09-N05 vandal resistant non-aerated spray device	0.5	Single hole deck mount; cast spout
	5EF-1D-WG	B-0199-06 vandal resistant aerator	2.2	Single hole deck mount; swivel gooseneck
	5EF-1D-WG-VF05	B-0199-06-N05 vandal resistant non-aerated spray device	0.5	Single hole wall mount; swivel gooseneck
	5EF-2D-DS	B-0199-09 vandal resistant aerator	2.2	4" center set; cast spout
	5EF-2D-DS-VF05	B-0199-09-N05 vandal resistant non-aerated spray device	0.5	4" center set; cast spout



B-7122-C01

- Enclosed stainless steel reel
- 3/8" x 30' (9m) heavy-duty blue hose
- EB-0107 high-flow blue spray valve
- Ratcheting retractable hose system
- 3/8" NPT female inlet
- Adjustable hose bumper
- Multi-fit bracket for wall, ceiling or under counter mounting



B-7132-01

- Enclosed stainless steel reel
- 3/8" x 35' (10.7 m) heavy-duty blue hose
- EB-0107 high-flow blue spray valve
- Ratcheting retractable hose system
- 3/8" NPT female inlet
- Adjustable hose bumper
- Multi-fit bracket for wall, ceiling or under counter mounting

B-7132-02

- Same as B-7132-01 except with MV-2516 rear trigger water gun



B-7222-C01

- Enclosed reel with epoxy coated steel finish
- 3/8" x 30' (9m) heavy-duty blue hose
- EB-0107 high-flow blue spray valve
- Ratcheting retractable hose system
- 3/8" NPT female inlet
- Adjustable hose bumper
- Multi-fit bracket for wall, ceiling or under counter mounting



B-7232-01

- Open reel with epoxy coated steel finish
- 3/8" x 35' (10.7m) heavy-duty blue hose
- EB-0107 high-flow blue spray valve
- Ratcheting retractable hose system
- 3/8" NPT female inlet
- Adjustable hose bumper
- Multi-fit bracket for wall, ceiling or under counter mounting




B-7132-U01WS7TC

- Recess mounted stainless steel hose reel cabinet containing 1/2" union inlets
- Open stainless steel hose reel with 35' (10.7 m) heavy-duty blue hose, 3/8" I.D.
- EB-0107 high-flow blue spray valve
- Continuous pressure vacuum breaker
- 6" wall bracket
- Control valve with quarter-turn Cerama cartridge with check valve
- Mixing valve with quarter-turn Cerama cartridges with check valves
- Shipped with all components needed for installation

T&S' SMART MODEL NUMBER SYSTEM MAKES IT EASY.

When you purchase a complete hose reel system from T&S, you get all the necessary parts to ensure code compliance and efficiency.

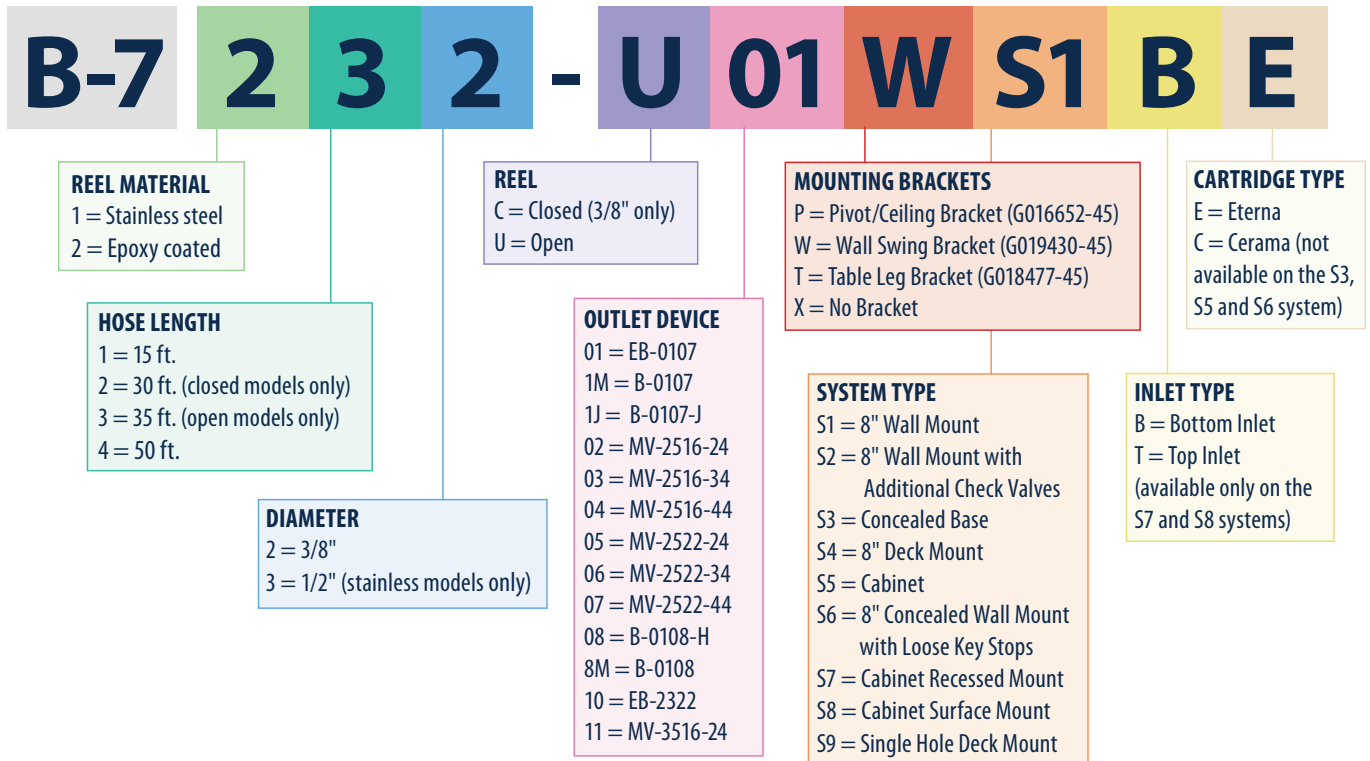

Which outlet device is required? Shower spray or heavy duty water gun? Front or rear trigger? How to choose?

When selecting an outlet device, keep in mind the size of the item or area to be washed, as well as how the operator might hold the device while in use. Considering the easiest position ahead of time will allow for maximum comfort and efficiency later.



01 EB-0107
• 5.6 GPM



02 MV-2516-24
• 5/16" Orifice



8M B-0108
• 1.07 GPM



1M B-0107
• 1.15 GPM



03 MV-2516-34
• 7/16" Orifice



10 EB-2322
• 4.2 GPM



1J B-0107-J
• 1.07 GPM



04 MV-2516-44
• 9/16" Orifice

05 MV-2522-24
• 5/16" Orifice

06 MV-2522-34
• 7/16" Orifice

07 MV-2522-44
• 9/16" Orifice

08 B-0108-H
• 3.28 GPM



11 MV-3516-24
• 5/16" Orifice



PG-35AV-CH

- 1/4" NPT male 360° swivel nut connection
- 35° angle spray valve with hold down clip
- 9' coiled polyurethane hose
- Heat resistant rubber grip handle



PG-8WREV

EasyInstall

- 1/2" NPT female inlets
- 8" wall mount mixing faucet with chrome plated brass body
- 9' coiled hose with angled aluminum spray valve
- Atmospheric vacuum breaker
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks to prevent cross flow of water



PG-8WSAV-08

EasyInstall

- 1/2" NPT female inlets
- 8" swing nozzle with stream regulator outlet
- 8" wall mount mixing faucet with chrome plated brass body
- 9' coiled hose with angled aluminum spray valve
- 90° swivel adapter
- Add-on faucet with polished chrome plated brass body
- EasyInstall 3/8" continuous pressure vacuum breaker
- Hose hanger hook with mounting screws
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks to prevent cross flow of water



PG-4DREV

EasyInstall

- 4" deck mount mixing faucet with chrome plated brass body
- 1/2" NPT female inlets
- 9' coiled hose with angled aluminum spray valve
- Add-on faucet with polished chrome plated brass body
- Atmospheric vacuum breaker
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks to prevent cross flow of water



P3-8WESV-08M-CR

EasyInstall

- 8" wall mount mixing faucet with chrome plated brass body
- 1/2" NPT female inlets
- Adjustable centers from 7 3/4" to 8 1/4"
- 96" flexible stainless steel hose with angled aluminum spray valve
- Add-on faucet with polished chrome plated brass body
- Atmospheric vacuum breaker
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks to prevent cross flow of water



B-0133-B

EasyInstall

- 8" wall mount mixing faucet with chrome plated brass body
- 1.15 GPM spray valve
- 1/2" NPT female eccentric inlets with 2" flanges
- 6" wall bracket
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks to prevent water cross flow



B-0155

- 6" swing nozzle add-on faucet
- Lock washer provided for rigid application
- Quarter-turn compression cartridge with spring check



B-0231

- 1/2" NPT female eccentric inlets with 2" flanges
- 12" rigid/swivel nozzle
- 8" wall mount mixing faucet with polished chrome plated brass body
- Lever handles with color coded indexes
- Quarter-turn compression cartridges with spring checks



B-0231-U12

ULTRARINSE™

- ULTRARINSE 8" wall-mount mixing faucet with a 12" swing nozzle
- ULTRARINSE spray arm with 3 spray tips (1.5 gpm)
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- The ULTRARINSE handle has two positions, spray and fill. Spray activates the fan tips, fill activates the nozzle
- 1/2" NPT female eccentric inlets with Ø 2" flanges



MPZ-8WLN-06

EasyInstall

- 8" rigid riser
- 1.15 GPM spray valve
- EasyInstall add-on 6" swing nozzle
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- 24" flexible stainless steel hose with heat resistant gray handle and hold down ring
- 1/2" NPT female eccentric inlets with 2" flanges



B-0300

- Single hole deck-mount mixing faucet
- 18" flexible inlet hoses (compression fittings for 5/8" O.D. tubing or 1/2" NPSM male thread)
- 5-3/4" swivel/rigid gooseneck (120X)
- B-LT stream regulator outlet
- Compression cartridges with spring checks
- Lever handles with color coded indexes



B-3950

- 2" NPT female x 1 1/2" NPT male adapter
- 2" NPT male outlet / 1 1/2" NPT female outlet
- 3 1/2" snap-in removable strainer
- Overflow outlet with cap & sealing washer
- Rotary waste valve for 3 1/2" sink opening with rough chrome plated body
- Twist handle with heat resistant plastic grip

B-39K

- Parts kit for waste valves
- Gaskets, washers, O-rings, bushing and C-ring



B-1146

- 4" wall mount mixing faucet with chrome plated brass body
- 5 3/4" swivel/rigid gooseneck with 2.2 GPM aerator (B-0199-01)
- Quarter-turn compression cartridges with spring checks
- Lever handles with color coded indexes
- 1/2" NPT male inlets



HG-4D-48K

- 3/4" NPT female quick-disconnect
- 3/4" NPT male freespin inlet
- 3/4" NPT male freespin outlet
- 360 rotatable hex nut rotates completely and freely
- 48" coated gas appliance connector
- Optimum torsional relief improves safety, increases connector life
- Provides efficient, full gas flow
- Quick-disconnect socket acts as shut-off valve when the plug and socket are disconnected
- Street elbow included

HG-4D-48SK

- Same as HG-4D-48K except with (2) 3/4" NPT male SwiveLink fittings

HG-4D-48S

- Same as HG-4D-48K except with (2) 3/4" NPT male SwiveLink fittings and (2) 90° elbows



002711-40NS

- Blue index and screw
- Lever handle
- Quarter-turn compression cartridge with spring check
- Temperature min: 40° F
- Temperature max: 140° F



002712-40NS

- Red index and screw
- Lever handle
- Quarter-turn compression cartridge with spring check
- Temperature min: 40° F
- Temperature max: 140° F



011276-45

- Ceramic cartridge, RTC without bonnet
- Temperature min: 40° F
- Temperature max: 180° F



011277-45

- Ceramic cartridge, LTC without bonnet
- Temperature min: 40° F
- Temperature max: 180° F

FEATURES / UPDATES OF NEW STYLE HANDLES



- A** Multiple handle options: 4-arm, 4" or 6" wrist and lever handles.
- B** Interlocking splines prevent walking, keeping the cartridge in place and handles set.
- C** Cartridges available in compression and ceramic.
- D** All cartridges are ¼ turn and include built-in checks for cross flow prevention.



BP-TMV-38C

- 3/8" compression connections (converts to 9/16-24 male thread by removing lock nuts and ferrules)
- Factory pre-set temperature approximately 100° F
- Integral check valves with filter screens in hot and cold inlets
- Thermostatic mixing valve with brass body
- Vandal Resistant locking temperature adjustment knob



B-0107

- 1.15 GPM spray valve
- 3/4-14 UN male inlet fitting
- Designed for heavy-duty use in industrial kitchens
- Hold down ring
- Shuts off when handle is released



B-0107-J

- 1.07 GPM spray nozzle
- 3/4-14 UN male inlet
- Designed for heavy-duty use in industrial kitchens
- High performance fan jet with knife action spray
- Hold down ring
- Shuts off when handle is released



B-0044-H

- 3/4-14 UN female inlet
- 3/4-14 UN female outlet
- 44" flexible stainless steel hose with heat resistant gray handle



B-9K-NS

- Fits all standard compression & ceramic cartridges
- Includes chrome plated metal lever handles, red & blue colored indexes & 2 screws



B-0969-RK01

- B-0969 vacuum breaker repair kit
- Includes brass insert, o-ring and piston



T&S BRASS AND BRONZE WORKS, INC.

2 Saddleback Cove • P.O. Box 1088 • Travelers Rest, SC 29690
U.S. Toll-free 800-476-4103 • +1 864-834-4102 • Fax 800-868-0084
E-mail customerservice@tsbrass.com
Canada Toll-free +1 888-288-0432

800-016271-45 Rev. 8 1/24