

MODERNFLAMES.COM



MODERN  FLAMES[®]
ELECTRIC FIREPLACES

2023/2024
LINEAR CATALOG
Premium Electric Fireplaces



MODERN FLAMES



ABOUT US

Modern Flames was established in 2009 and has quickly become the innovative leader in contemporary electric fireplace design and technology. After pioneering the linear electric fireplace throughout North America, Modern Flames' brand has skyrocketed with many firsts to market which include; the first linear recessed electric fireplace, the first fully built-in electric fireplace, the first outdoor electric and now the first steam electric fireplace. Modern Flames has reinvented the electric fireplace look with its NEW Hybrid-FX™ flame technology. Modern Flames' products have

gained notoriety with architects, designers, builders and homeowners for its unbelievable life-like flame appearance, ease of installation and affordable cost to the builder compared to wood and gas. With global movement into greener building and high efficiency products, With a new corporate headquarters and expanded warehouse in Phoenix, Arizona, Modern Flames continues to be a leader in the electric fireplace industry. Modern Flames is innovating the industry standards of tomorrow.

2

modernflames.com



Stay current with
our products and
accessories on our
modernflames.com
web site



COVER PHOTO
Landscape Pro™ Slim 56"

CONTENTS

4-7 Landscape Pro™ Multi Series

The Most Versatile Electric Fireplace
Now Indoor/Outdoor Approved

8-11 Mantel Series for Landscape Pro™ Multi

Artfully crafted and American Made Mantels

12-15 Landscape Pro™ Slim Series

Built-In Clean Face with Unique Frameless Design
Now Indoor/Outdoor Approved

16-19 Spectrum Slimline Series

Recessed Flush Mount or Wall Mount



web site

modernflames.com

**APPROVED**
INDOOR/OUTDOOR USE



Landscape Pro™ Multi 56"

modernflames.com

LANDSCAPE PRO™ MULTI

The Most Versatile Electric Fireplace on the Market

- MULTI SIZES: 44" | 56" | 68" | 80" | 96" | 120"
- MULTI INSTALL DEPTHS: BUILT-IN CLEAN FACE - PARTIAL 2x4 RECESS - WALL MOUNT
- MULTI CONFIGURATIONS: SINGLE SIDED, LEFT CORNER, RIGHT CORNER & 3-SIDED (BAY)
- MULTI LIGHT CONTROL: FLAME COLOR, EMBER BED COLOR & DOWNLIGHTING COLOR
- MULTI LIGHT COLORS: FULL RGB COLOR SPECTRUM IN ALL LIGHTING FEATURES

Up to 10 different install configurations included standard in the box!*

**Wall mount kits sold separately.*

Choose a beautiful single sided installation or get creative and design the fireplace exactly how you want into the feature wall of your dreams.



Landscape Pro™ Multi 44"



Landscape Pro™ Multi 44"

New high intensity multi-color flame technology paired with matching up lighting and downlighting create the full customizable experience in the home.

Hundreds of different stunning color combinations to select from!



STANDARD FEATURES

LIGHTING

- Higher Intensity Ember Bed Activity
- Improved Flames
- Higher Intensity Flame LEDs

MEDIA

- Clear Acrylic Stone Media
- Black Smoke Acrylic Crystals
- Hand-Painted Canyon Driftwood
- New Log Design – Highly Detailed Realism

HEAT

- Up To 10,000 BTU Heat Output
- High Efficiency PTC Ceramic Heater

CONTROLS & FUNCTIONS

- Wi-Fi Connect to Fireplace (Alexa/Google home compatible)
- Basic Features Manual Controls
- Flame Speed (4 speed settings)
- Full Feature Remote Control
 - RGB Color Wheel
 - Brightness Slide Bar

OPTIONAL UPGRADES

- Standard Single-Sided Trim included
- 5 Piece Trim Kit (sold separate)

UPGRADED MEDIA

- ½" Reflective Fireglass – 10 lb. jars
 - 7 Color Options
- Wall Mount Cabinets

OPTIONAL CONTROL

- Wireless Thermostat & Full Wall Control

LIGHTING - INDEPENDENT COLOR CONTROL

Full Color Spectrum Lighting for Flames, Ember Bed & Downlighting



MEDIA - **NEW** PREMIUM LOG DESIGN STANDARD



HEAT - 5,000 - 10,000 BTU

120V & 240V High Efficiency Ceramic Heater - Indoor & Outdoor Approved



FLAMES & LIGHTING
15 WATTS
NO HEAT



1500 WATT HEATER
120V 5,000 BTU
UP TO 400 SQ FT



3000 WATT HEATER
240V 10,000 BTU
UP TO 800 SQ FT

MODERN FLAMES

Landscape Pro™ Multi Fireplaces are equipped with adjustable heaters controlled by remote or phone app. Wireless Wall Control has thermostat controls.



STANDARD CONTROLS

REMOTE CONTROL & MANUAL CONTROL



MODERN FLAMES


FULL FEATURED
Wi-Fi APP



UPGRADE CONTROLS

WIRELESS WALL THERMOSTAT CONTROL

Sold separately.

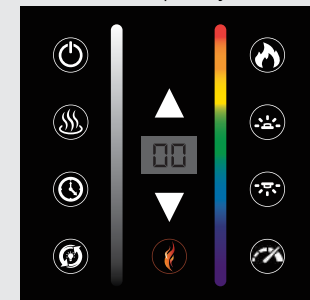

PT# MF-PRO-V2-WTC




MULTI INSTALLATIONS - MULTIPLE DIFFERENT CONFIGURATIONS

MULTI INSTALL DEPTHS:

- BUILT-IN CLEAN FACE
- PARTIAL 2x6 RECESS
- WALL MOUNT*

MULTI CONFIGURATIONS:


- SINGLE SIDED
- LEFT CORNER
- RIGHT CORNER
- WALL MOUNT*
- BUILT-IN RECESSED (2X4)
- FLOATING WALL CABINET
- 3-SIDED (BAY)
- FLOOR CABINET

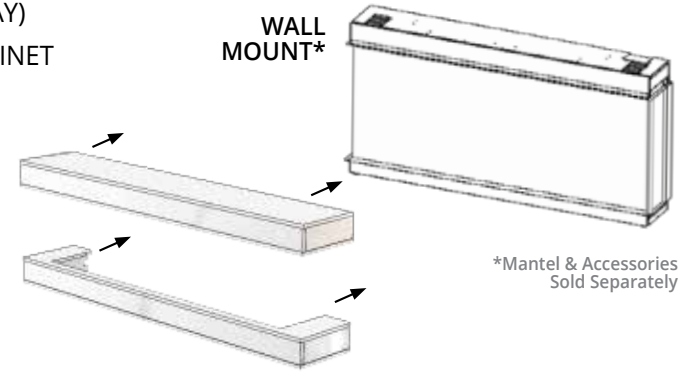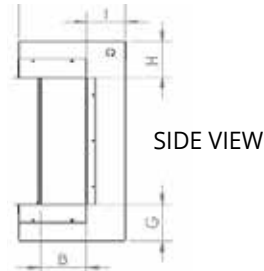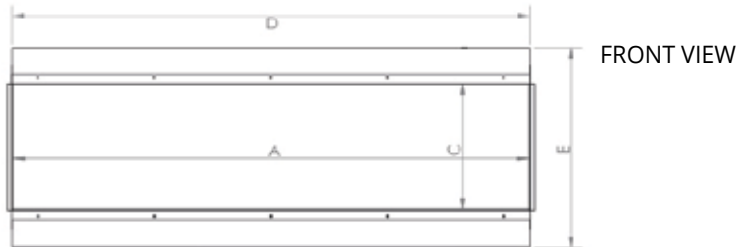


*Mantel & Accessories Sold Separately

MODEL & CONFIGURATION		VIEWING AREA			FIREBOX DIMENSIONS					
MODEL #	CONFIGURATION	A FRONT GLASS WIDTH	B SIDE GLASS WIDTH	C GLASS HEIGHT	D OVERALL WIDTH	E OVERALL HEIGHT	F OVERALL DEPTH	G BOTTOM TO VIEWING	H TOP TO VIEWING	I BACK TO VIEWING
LPM-4416V2	SINGLE SIDED	43.75" (1111.25mm)	-	15.75" (400.05mm)	44.0625" (1119.19mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	-
	CORNER (L/R)	43.75" (1111.25mm)	5" (127mm)	15.75" (400.05mm)	44.0625" (1119.19mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
	3-SIDED (BAY)	43.75" (1111.25mm)	5" (127mm)	15.75" (400.05mm)	44.0625" (1119.19mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
LPM-5616V2	SINGLE SIDED	55.75" (1416.05mm)	-	15.75" (400.05mm)	56.0625" (1423.99mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	-
	CORNER (L/R)	55.75" (1416.05mm)	5" (127mm)	15.75" (400.05mm)	56.0625" (1423.99mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
	3-SIDED (BAY)	55.75" (1416.05mm)	5" (127mm)	15.75" (400.05mm)	56.0625" (1423.99mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
LPM-6816V2	SINGLE SIDED	67.75" (1720.85mm)	-	15.75" (400.05mm)	68.0625" (1728.79mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	-
	CORNER (L/R)	67.75" (1720.85mm)	5" (127mm)	15.75" (400.05mm)	68.0625" (1728.79mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
	3-SIDED (BAY)	67.75" (1720.85mm)	5" (127mm)	15.75" (400.05mm)	68.0625" (1728.79mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
LPM-8016V2	SINGLE SIDED	79.75" (2025.65mm)	-	15.75" (400.05mm)	80.0625" (2031.59mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	-
	CORNER (L/R)	79.75" (2025.65mm)	5" (127mm)	15.75" (400.05mm)	80.0625" (2031.59mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
	3-SIDED (BAY)	79.75" (2025.65mm)	5" (127mm)	15.75" (400.05mm)	80.0625" (2031.59mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
LPM-9616V2	SINGLE SIDED	96.75" (2457.45mm)	-	15.75" (400.05mm)	96.0625" (2439.99mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	-
	CORNER (L/R)	96.75" (2457.45mm)	5" (127mm)	15.75" (400.05mm)	96.0625" (2439.99mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
	3-SIDED (BAY)	96.75" (2457.45mm)	5" (127mm)	15.75" (400.05mm)	96.0625" (2439.99mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
LPM-12016V2	SINGLE SIDED	119.75" (3041.65mm)	-	15.75" (400.05mm)	120.0625" (3049.59mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	-
	CORNER (L/R)	119.75" (3041.65mm)	5" (127mm)	15.75" (400.05mm)	120.0625" (3049.59mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)
	3-SIDED (BAY)	119.75" (3041.65mm)	5" (127mm)	15.75" (400.05mm)	120.0625" (3049.59mm)	25" (635mm)	11.625" (295.28mm)	4.625" (117.48mm)	4.625" (117.48mm)	4.125" (104.78mm)

Note Dimensions include screw heads on the exterior of the fireplace.

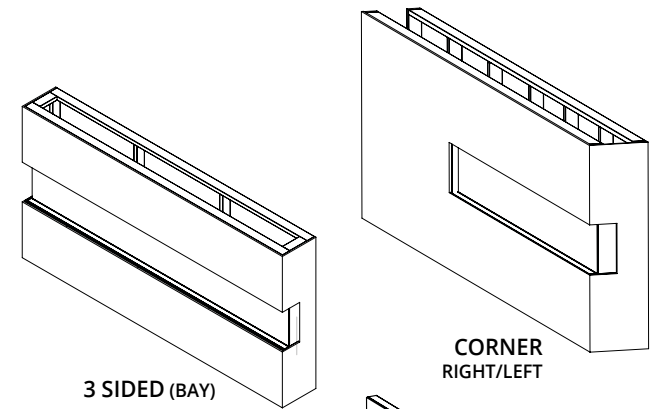

CORNER
RIGHT/LEFT

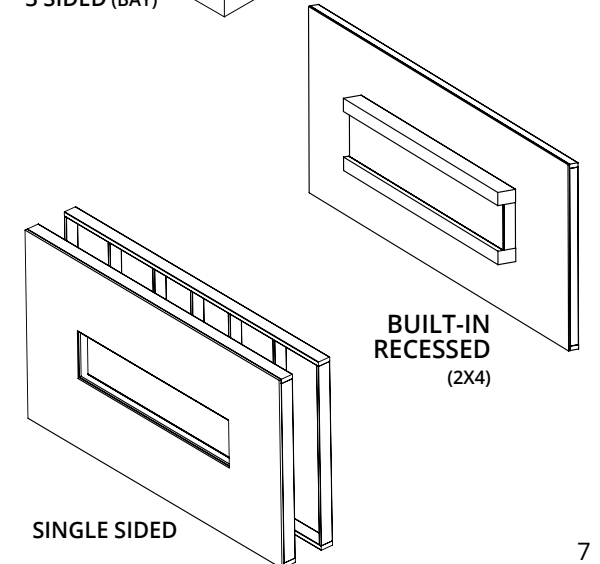

SINGLE SIDED



 Hybrid-FX™
FLAME TECHNOLOGY
Landscape Pro 56"
Install: Partially Recessed with mantels

LANDSCAPE PRO™ MULTI STUDIO SUITES

Modern Flames Landscape Pro™ Multi Studio Suites are artfully crafted and American Made. These mantels are specifically designed for our Landscape Pro™ Multi for a wall mount application. Constructed with high detail woods the Studio Suites are available in a Driftwood Gray, Weathered Walnut, Coastal Sand or white paint grade ready for the DIY'er to finish it off themselves. For the wall mount applications simply attach the Landscape Pro™ Multi to the wall and then attach the Suites mounting brackets for the top and bottom pieces. The additional fireplace that is exposed from the wall will be finished off with the top and bottom and side wood furniture pieces. These Studio Suites are the perfect way to finish off this fully featured electric fireplace. **Mantels are sold separately from fireplace.*



Landscape Pro™ Multi 56"


STUDIO SUITES - LANDSCAPE PRO™ MULTI

Dimension Specs

WALL MOUNT MANTEL DIMENSIONAL SPECS (Assembled)

Part #	Width	Height	Depth
WMC-44LPM-(#Color)	58.5	28	14
WMC-56LPM-(#Color)	70.5	28	14
WMC-68LPM-(#Color)	82.5	28	14
WMC-80LPM-(#Color)	94.5	28	14


COLORS: COASTAL SAND (CS), WEATHERED WALNUT (WW), DRIFTWOOD GRAY (DG), READY TO PAINT (RTF)

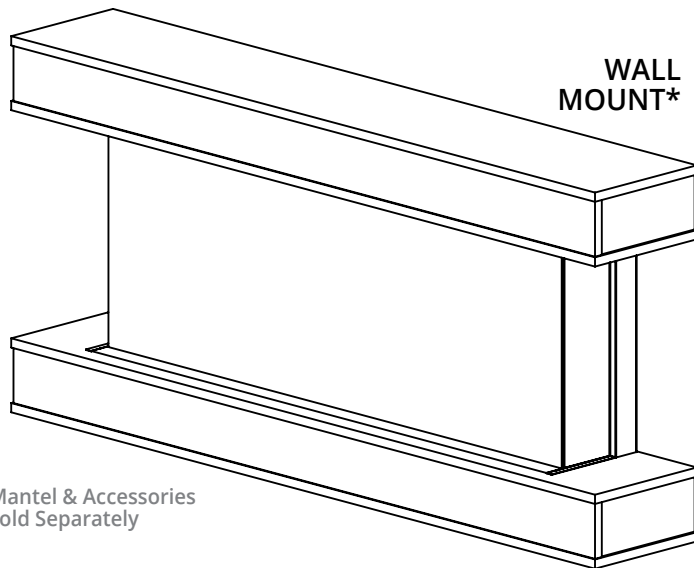



 Hybrid-FX™
FLAME TECHNOLOGY
Landscape Pro 56"
Install: Partially Recessed
with mantels


APPROVED
INDOOR/OUTDOOR USE

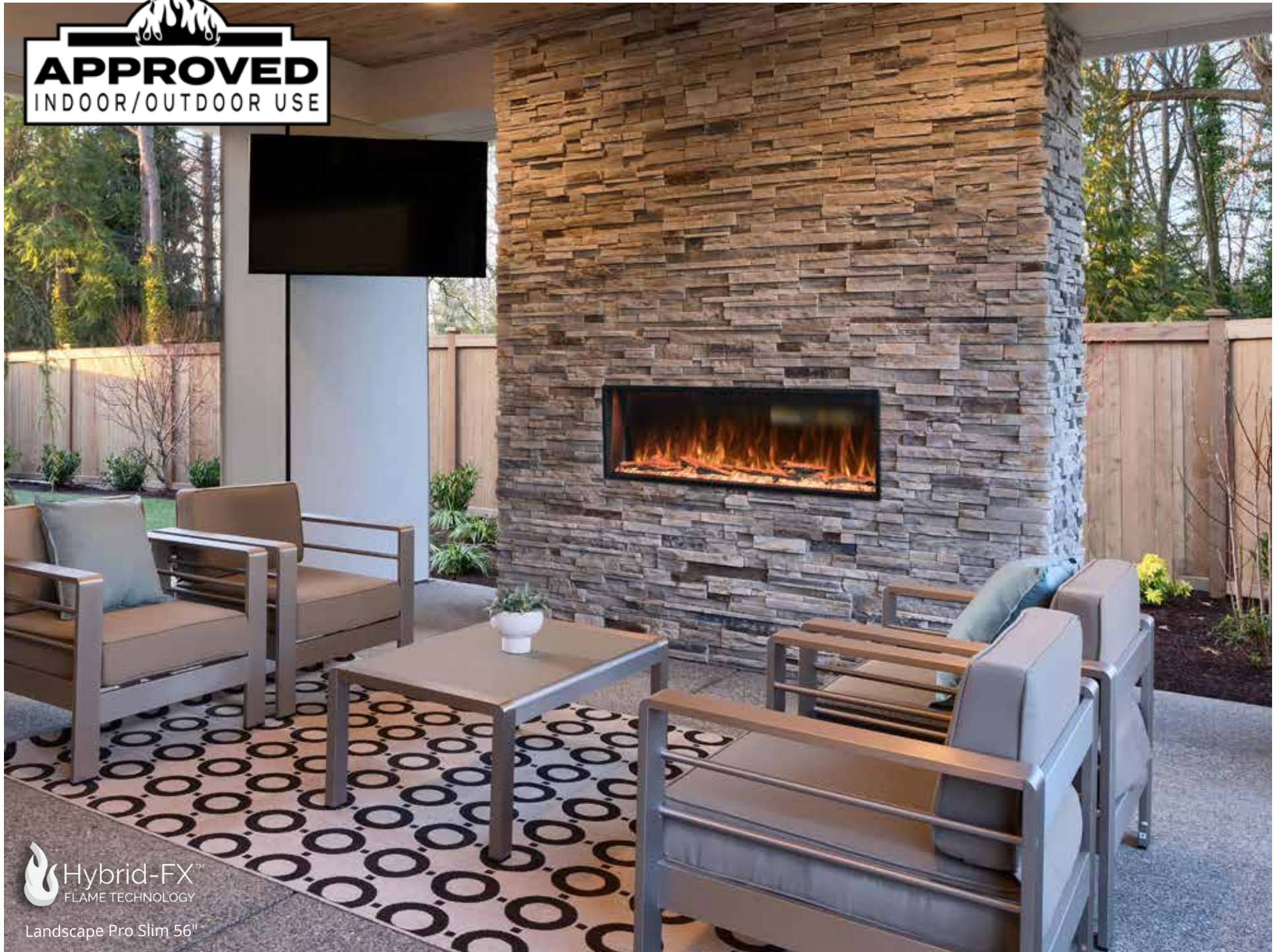

 Hybrid-FX™
FLAME TECHNOLOGY

Landscape Pro Slim 56"
















LANDSCAPE PRO™ SLIM SERIES

Built-in Clean Face Electric Fireplace

The Landscape Pro™ Slim electric fireplace is the perfect option for any customer looking for a unique frameless look installed into a 2" x 6" wall. This new Slim model in the Landscape Pro™ Series features independently controlled flame plus up & down lighting with an edge-to-edge viewing area. This Pro Series model features NEW Hybrid-FX™ flame technology, high intensity LED lighting and active ember bed, Driftwood Logs & Wi-Fi controls all as standard features. The Landscape Pro Slim features a 5000 BTU heater, remote and wireless control and comes in 5 linear sizes, 44" | 56" | 68" | 80" | 96".



STANDARD FEATURES

-  Outdoor Rated/Approved
-  Hybrid=FX™ Flame Technology
-  NEW Log Set – Highly Detailed Realism
-  IMPROVED Flame, Ember Bed & Down lighting Controlled, Independently or Together
-  Flame Speed Controls (4 speeds)
-  2 Different Ember Bed Stone Styles
-  Full Flame Viewing Area
-  Fully Finished Clean Face Installation
-  Finish Trim Kit Included
-  5,000 BTU Variable Heater
-  Semi-Reflective Screens Available
-  Variable Flame Speed
-  Remote Control
-  Hidden Manual Controls
-  Wi-Fi Controls with Modern Flames App (Alexa/Google)

LANDSCAPE PRO™ SLIM SERIES

Driftwood Logs & Acrylic Ember Bed Included Standard



Fireplace Available in 5 Standard Linear Widths:

44"

56"

68"

80"

96"



Flames & Ember Bed Colors - Several Color Combinations Available & Controlled Independently



MEDIA - **NEW** PREMIUM LOG DESIGN




Comes Standard with 2 Types of Acrylic Media: Smoke & Clear



MODEL	VIEWING AREA		FIREBOX DIMENSIONS			FRAMING DIMENSIONS
	A	B	C	D	E	W x H x D
LPS-4414V2	13.375" (355.6mm)	43.25" (1098.55")	6" (152.4mm)	23.75" (603.25mm)	44.0625" (1119.19mm)	44 1/4" W x 24 1/8" H x 6" D (1130mm W x 613mm H x 152mm D)
LPS-5614V2	13.375" (355.6mm)	55.25" (1403.35mm)	6" (152.4mm)	23.75" (603.25mm)	56.0625" (1423.99mm)	56 1/4" W x 24 1/8" H x 6" D (1435mm W x 613mm H x 152mm D)
LPS-6814V2	13.375" (355.6mm)	67.25" (1708.15mm)	6" (152.4mm)	23.75" (603.25mm)	68.0625" (1728.79mm)	68 1/4" W x 24 1/8" H x 6" D (1740mm W x 613mm H x 152mm D)
LPS-8014V2	13.375" (355.6mm)	79.25" (2012.95mm)	6" (152.4mm)	23.75" (603.25mm)	80.0625" (2033.59mm)	80 1/4" W x 24 1/8" H x 6" D (2045mm W x 613mm H x 152mm D)
LPS-9614V2	13.375" (355.6mm)	95.25" (2419.35mm)	6" (152.4mm)	23.75" (603.25mm)	96.0625" (2439.99mm)	96 1/4" W x 24 1/8" H x 6" D (2451mm W x 613mm H x 152mm D)


Note Dimensions include screw heads on the exterior of the fireplace. Interior viewing dimensions include the trim kit.

US Patent 11473745

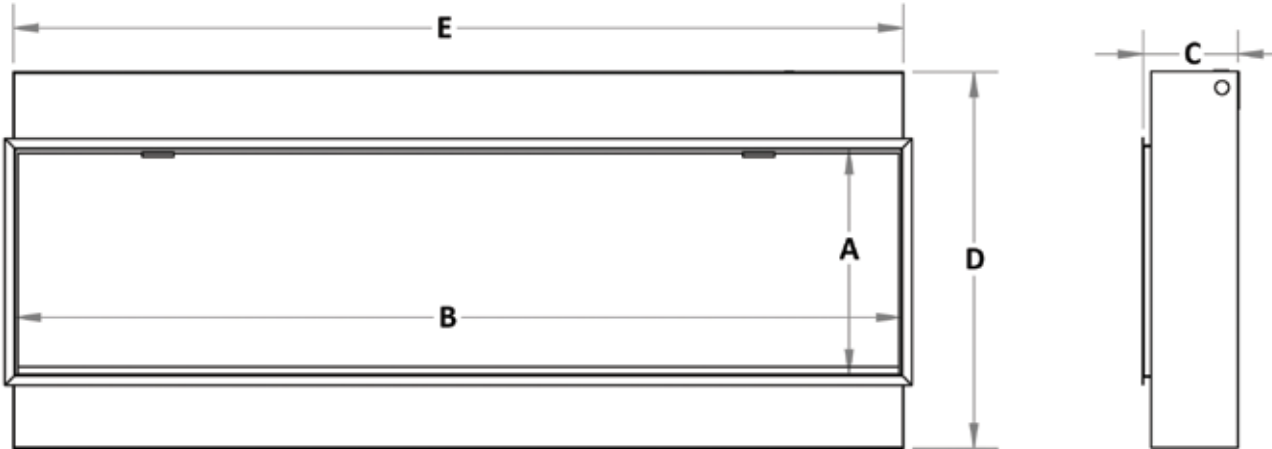

LANDSCAPE PRO SLIM - OPTIONAL INVISIBLE NON GLARE MESH SCREEN

 Optional invisible non glare mesh screen, in place of glass front.



Close up



STANDARD CONTROLS

REMOTE CONTROL & MANUAL CONTROL



MODERN FLAMES


FULL FEATURED
Wi-Fi APP



UPGRADE CONTROLS

WIRELESS WALL THERMOSTAT CONTROL

Sold separately.

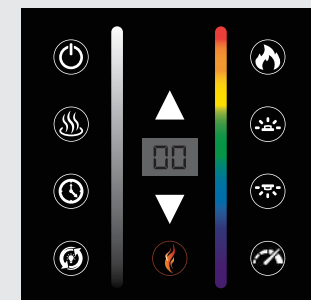

PT# MF-PRO-V2-WTC



 Hybrid-FX™
FLAME TECHNOLOGY













SPECTRUM SLIMLINE SERIES

Recessed Flush Mount or Wall Mount Electric Fireplace

Modern Flames new Spectrum Slimline has revamped the recessed electric fireplace category. This 2" x 4" or wall mount installation electric fireplace has removed the large black glass surround and is finished off with a sleek 5/8" trim to maximize the viewing area. Hardwoods or tile can be finished right up to the opening of the fireplace while still keeping in mind serviceability. The Spectrum Slimline features high intensity flame and ember bed lighting showcasing our new Hybrid-FX™ flame technology independently controlled with 10 different color options. Other standard features include variable & thermostatic heat, variable motor controls, timer, push button and remote controls. The acrylic crystal media and driftwood logs are both standard media and the Spectrum Slimline is available in 50", 60", 74" & 100" sizes.



STANDARD FEATURES

-  Hybrid-FX™ Flame Technology
-  Log Set – Highly Detailed Realism
-  10 Color Flame Combinations with Ember Bed Lighting, plus color auto cycling.
-  Glacier Glass Ember Bed
-  Low Energy LED Flame Technology
-  Touch Button Controls
-  New Sleek Remote
-  Can be Installed Beneath a TV
-  Variable Heat with Thermostat
-  Variable Flame Controls
-  120 Volt Plug
-  Do it Yourself Installation Instructions

SPECTRUM SLIMLINE SERIES

Independent Flame & Ember Bed Color Combinations

The 6 button control panel is located at the top right of fireplace including a digital readout thermostat. From right to left, button #1 turns the fireplace on or off. Button #2 controls ember bed lights. #3 controls the flame colors #4 turns the heater on or off. Button #5 controls timer setting to turn off fireplace at selected time, and button #6 adjusts the desired heater temperature.



10 Flame & Ember Bed Colors Controlled Independently - Examples Shown Below



Blue Flames & Blue Ember Bed



Blue Flames & Orange Ember Bed



Orange Flames & Orange Ember Bed



Gold Flames & Gold Ember Bed



Green Flames & Green Ember Bed



Magenta Flames & Magenta Ember Bed



Pink Flames & Blue Ember Bed



Red Flames & Red Ember Bed



Purple Flames & Blue Ember Bed



Orange Flames & Blue Ember Bed



Gold Flames & Green Ember Bed



Purple Flames & Purple Ember Bed

SPECTRUM SLIMLINE SERIES



Dimension Specs

SPECTRUM SLIMLINE DIMENSIONAL SPECS

Model Number	A	B	C	D	E	F	G	H	FINISHED OPENING DIMENSIONS W x H x D
SPS-50B	49-3/4" (1264mm)	17" (430mm)	4-3/4" (121mm)	48-5/8" (1235mm)	16-1/8" (410mm)	4" (102mm)	46" (1168mm)	12" (305mm)	48-7/8" (1242mm) x 16-1/4" (413mm) x 4" (102mm) minimum
SPS-60B	59-3/4" (1518mm)	17" (430mm)	4-3/4" (121mm)	58-5/8" (1489mm)	16-1/8" (410mm)	4" (102mm)	55-13/16" (1418mm)	12" (305mm)	58-7/8" (1496mm) x 16-1/4" (413mm) x 4" (102mm) minimum
SPS-74B	73-3/4" (1873mm)	17" (430mm)	4-3/4" (121mm)	72-5/8" (1845mm)	16-1/8" (410mm)	4" (102mm)	69-3/4" (1772mm)	12" (305mm)	72-7/8" (1851mm) x 16-1/4" (413mm) x 4" (102mm) minimum
SPS-100B	99-3/4" (2534mm)	17" (430mm)	4-3/4" (121mm)	98-5/8" (2505mm)	16-1/8" (410mm)	4" (102mm)	95-7/8" (2435mm)	12" (305mm)	98-7/8" (2512mm) x 16-1/4" (413mm) x 4" (102mm) minimum

FINISHED OPENING DIMENSIONS

W Width x H Height x D Depth

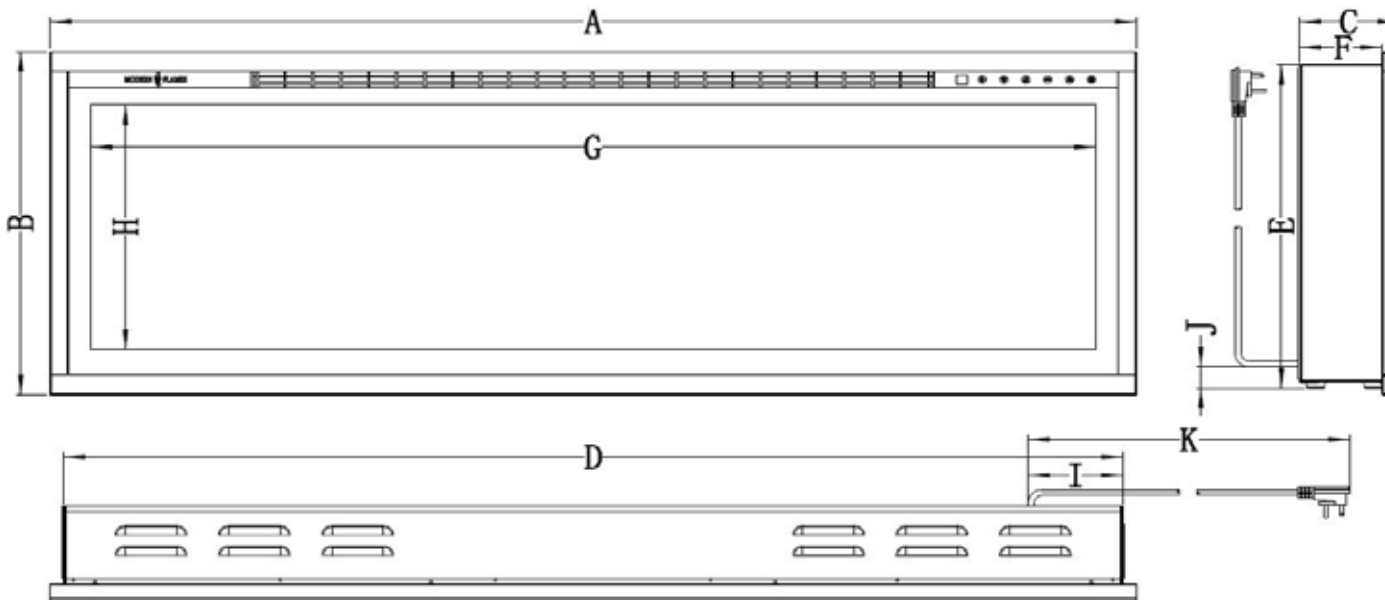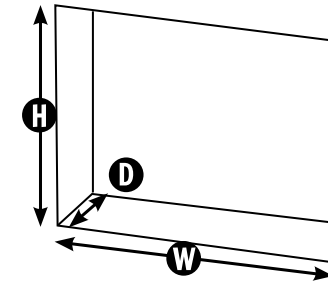

REMOTE CONTROL

Separate controls for on/off variable heat and variable flame, with independent flame & ember bed variable colors.





MODERN FLAMES WEBSITE

RPG BRANDS

RPG BRANDS FAMILY OF COMPANIES

MODERN FLAMES[®]
ELECTRIC FIREPLACES

WILDFIRE[®]
OUTDOOR SIZING

GRAND CANYON
GAS LOGS

ModernFlames.com

3515 E. Atlanta Ave. Phoenix, AZ 85040

(602) 268-9353 • (877) 246-9353

customerservice@ModernFlames.com



*Copyright© 2023 RPG Brands (Modern Flames). All rights reserved.
Products and specifications subject to change without notice.
US Patent 11473745*

Inc.
5000

022024