



Invisible Shelf Bracket & Raised Vanity Support


INVISIBLE SHELF BRACKETS

You have asked and we have answered, robust support for floating shelves

- Available in 6", 9", 12" and 15"
- ISB6-700lbs; ISB9-500lbs; ISB12-350lbs; ISB15-250lbs (load to deformation per pair)
- Black powder coat Formica match 909-58
- ISB - 1/4" material at attachment with 3/4" round bar projection
- Slotted mounting holes for 1/4" hardware
- Floating shelf installation made easy for finished walls
- No need for long horizontal bars with multiple support arms
- Cut out the drywall install bracket and shelf covers up drywall hole
- Recommend backing when used with metal studs

Formica color match:

■ Black 909-58

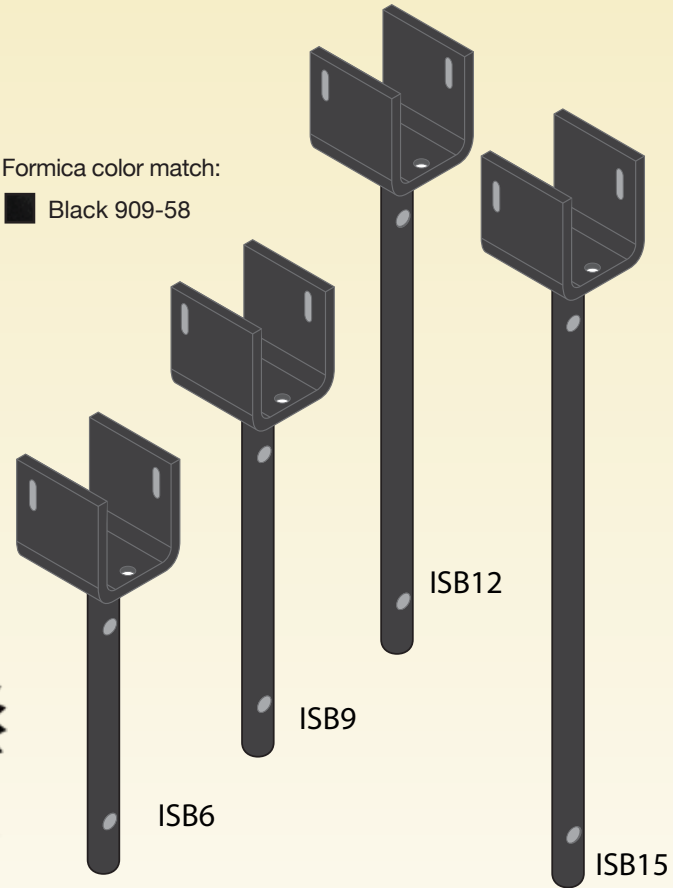


Patent pending
ISB#
29/947,240

Bracket Size	Pcs/Wgt/Box	Load to Deformation (lbf)
ISB6	2pcs/3lbs	700/pr
ISB9	2pcs/4lbs	500/pr
ISB12	2pcs/4lbs	350/pr
ISB15	2pcs/5lbs	250/pr

RAISED VANITY BRACKETS

Intended for raised vanity support these brackets may also be used as a very strong bench, work bench, shelf, and countertop support.

- Available in 18" and 21"
- RV18-1600lbs; RV21-2000lbs (load to deformation per pair)
- Black powder coat Formica match 909-58
- RV - 1/2" flat metal material with 3/4" support arm
- Slotted mounting holes for 1/4" hardware
- Recommend backing when used with metal studs

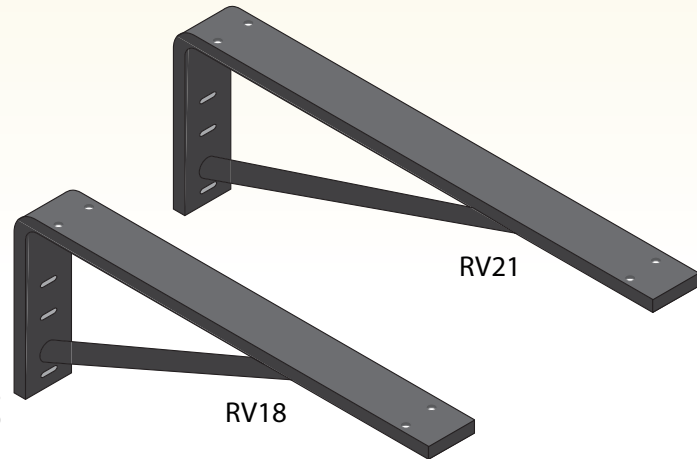

Patent pending
RV#
29/947,233

Bracket Size	Pcs/Wgt/Box	Load to Deformation (lbf)
RV18	2pcs/17lbs	1600/pr
RV21	2pcs/19lbs	2000/pr

A&M HARDWARE, INC.

Call To Order (888) 647-0200

1165 Strickler Road, Mount Joy, PA 17552 | Fax: (717) 653-5874

www.AandMhardware.com