




HYBRID BRACKETS

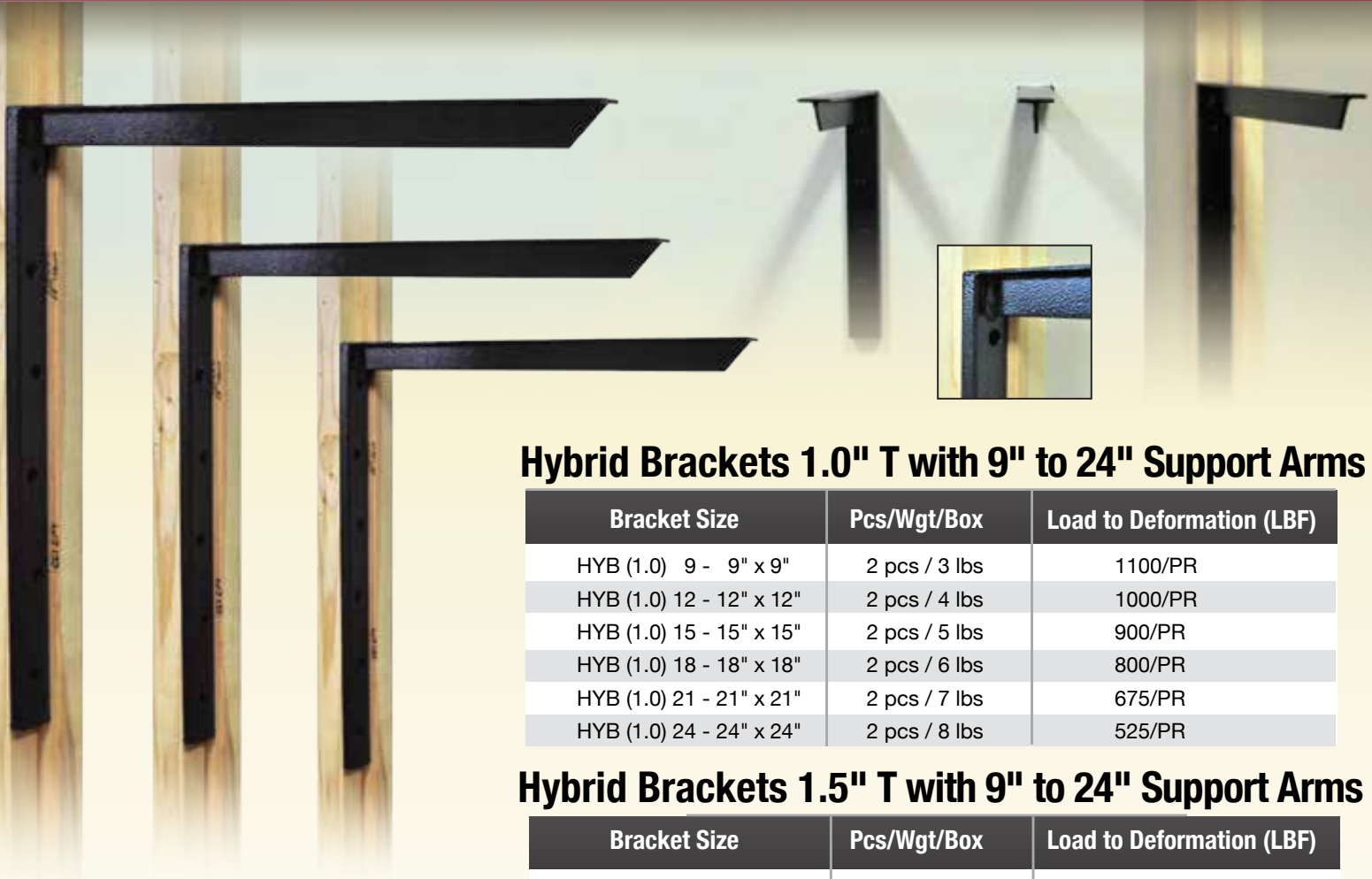

Hybrid Brackets 1.0" T with 9" to 24" Support Arms

Bracket Size	Pcs/Wgt/Box	Load to Deformation (LBF)
HYB (1.0) 9 - 9" x 9"	2 pcs / 3 lbs	1100/PR
HYB (1.0) 12 - 12" x 12"	2 pcs / 4 lbs	1000/PR
HYB (1.0) 15 - 15" x 15"	2 pcs / 5 lbs	900/PR
HYB (1.0) 18 - 18" x 18"	2 pcs / 6 lbs	800/PR
HYB (1.0) 21 - 21" x 21"	2 pcs / 7 lbs	675/PR
HYB (1.0) 24 - 24" x 24"	2 pcs / 8 lbs	525/PR

Hybrid Brackets 1.5" T with 9" to 24" Support Arms

Bracket Size	Pcs/Wgt/Box	Load to Deformation (LBF)
HYB (1.5) 9 - 9" x 9"	2 pcs / 5 lbs	2500/PR
HYB (1.5) 12 - 12" x 12"	2 pcs / 7 lbs	2220/PR
HYB (1.5) 15 - 15" x 15"	2 pcs / 8 lbs	1635/PR
HYB (1.5) 18 - 18" x 18"	2 pcs / 10 lbs	1300/PR
HYB (1.5) 21 - 21" x 21"	2 pcs / 12 lbs	1165/PR
HYB (1.5) 24 - 24" x 24"	2 pcs / 14 lbs	1050/PR

Formica color matches:

Black 909-58

White 933-58

HYBRID BRACKET (SURFACE MOUNT OR CONCEALED/FLOATING)

Our Hybrid Bracket can be installed as either a Surface Mount or Concealed (floating) Bracket. Concealed Installation is done by ripping a 2x4 and mounting it to the stud. The bracket is then mounted to the recessed, ripped 2x4. Install the drywall over the bracket "T". This bracket is available in a 1.5" or 1" version.

- 1.0" or 1.5" T and 9", 12", 15", 18", 21" and 24" support arms
- Load limit range of 525 lbs. to 2,200 lbs. per pair
- Black or White Formica Color Match, krinkle powder coat
- All sizes packaged 2 pcs per box
- Finishing caps provided
- Mounting hardware not included



HARDWARE, INC.

Call To Order (888) 647-0200

1165 Strickler Road, Mount Joy, PA 17552 | Fax: (717) 653-5874

www.AandMhardware.com