



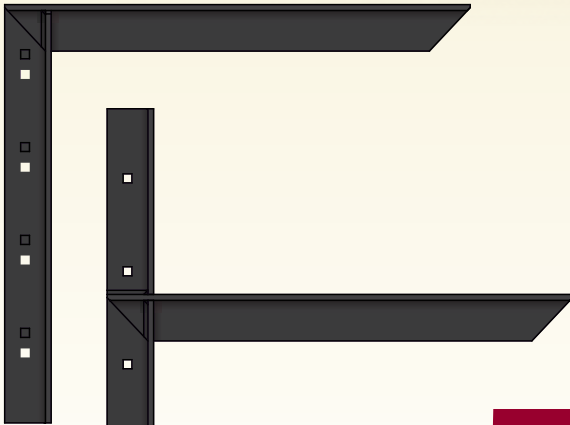

2.0" CONCEALED BRACKETS

STEEL CONSTRUCTION (VERY STRONG)

- 2.0" version: 9", 12", 15", 18", 21", 24" and 30" support arm lengths
- Available with upper extension (EC) and without (C)
- Upper extension (above the support arm) provides superior strength
- Load limit range of 1,000 lbs. to 7,960 lbs. per pair
- Mounting hardware included (3/8" - 16 x 3" carriage bolt assemblies)
- All welds on reverse for easy, clean install
- All sizes packaged 2 pcs per box
- Available in Black, White, Almond and Gray powder coat
- Concealed 9", 12", 18" and 24" Brackets available in US Made in 2.0" (Black only)
- C/EC 15", 21" and 30" Brackets available in Black and White only
- Recommend backing when used with metal studs

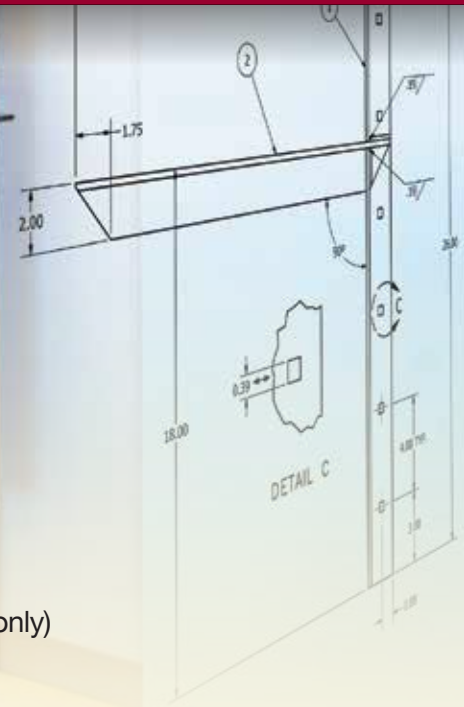

Formica color matches:

- Black 909-58
- White 933-58
- Gray 961-58
- Almond 920-58

2.0" Concealed Brackets – 9" to 30" Support Arm Mounting Hardware Included (3/8" - 16 x 3" carriage bolt assemblies)

Bracket Size	Pcs/Wgt/Box*	Load to Deformation (LBF)
C(2.0)9	2 pcs/11 lbs	4520/PR
C(2.0)12	2 pcs/12 lbs	2500/PR
C(2.0)15	2 pcs/13 lbs	2170/PR
C(2.0)18	2 pcs/18 lbs	2060/PR
C(2.0)21	2 pcs/19 lbs	1660/PR
C(2.0)24	2 pcs/22 lbs	1830/PR
C(2.0)30	2 pcs/27 lbs	1000/PR

2.0" Extended Concealed Brackets – 9" to 30" Support Arm Mounting Hardware Included (3/8" - 16 x 3" carriage bolt assemblies)

Bracket Size	Pcs/Wgt/Box*	Load to Deformation (LBF)
EC(2.0)9	2 pcs/14 lbs	7960/PR
EC(2.0)12	2 pcs/16 lbs	3100/PR
EC(2.0)15	2 pcs/17 lbs	2235/PR
EC(2.0)18	2 pcs/22 lbs	2950/PR
EC(2.0)21	2 pcs/22 lbs	1665/PR
EC(2.0)24	2 pcs/24 lbs	2320/PR
EC(2.0)30	2 pcs/31 lbs	1375/PR

A&M HARDWARE, INC.

Call To Order (888) 647-0200

1165 Strickler Road, Mount Joy, PA 17552 | Fax: (717) 653-5874

www.AandMhardware.com