

MULTI-UNIT RESIDENTIAL

MAY 2023



LIGHTING FOR EVERY SPACE



Liteline Corporation is Canada's largest independent lighting manufacturer that has been in operation since 1979. Offering a wide range of product for residential to commercial applications, Liteline focuses on three core principles; innovation, installation efficiency, and the best customer service. Staffed to help you every step of the way, Liteline is headquartered in a 160,000 sq-ft facility with a warehouse, and 3 distribution centers across Canada in Toronto, Vancouver, and Montreal, to ensure timely delivery for any job.


WHY CHOOSE LITELINE

LIFETIME WARRANTY



Liteline Corporation provides a lifetime warranty for our Gold Label products and warrants that they will not fail for the product's life cycle.

PHOTOMETRICS

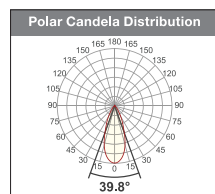

Liteline provides all photometric data including TM-30, tested in our labs. See product spec sheet for more details.

QUICKSHIP PROGRAM



Liteline's QuickShip Program is a win-win solution for quick retrieval of In-Stock and Made-to-Order product SKUs of 100 pieces or less. Specify product features within the blue shaded area of the ordering guide for QuickShip ready product SKUs.



In-Stock products ship within two business days of an order being received.



Made-To-Order products ship within seven business days of an order being received.



LIGHTING FOR EVERY SPACE

Liteline Corporation is Canada's largest independent lighting manufacturer that has been in operation since 1979. Offering a wide range of product for residential to commercial applications, Liteline focuses on three core principles; innovation, installation efficiency, and the best customer service. Staffed to help you every step of the way, Liteline is headquartered in a 160,000 sq-ft facility with a warehouse, and 3 distribution centers across Canada in Toronto, Vancouver, and Montreal, to ensure timely delivery for any job.


WHY CHOOSE LITELINE

LIFETIME WARRANTY



Liteline Corporation provides a lifetime warranty for our Gold Label products and warrants that they will not fail for the product's life cycle.

PHOTOMETRICS

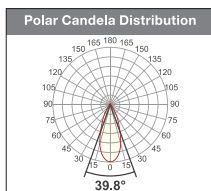

Liteline provides all photometric data including TM-30, tested in our labs. See product spec sheet for more details.

QUICKSHIP PROGRAM



Liteline's QuickShip Program is a win-win solution for quick retrieval of In-Stock and Made-to-Order product SKUs of 100 pieces or less. Specify product features within the blue shaded area of the ordering guide for QuickShip ready product SKUs.



In-Stock products ship within two business days of an order being received.



Made-To-Order products ship within seven business days of an order being received.

GET THE LOOK

APPLICATION IN-SUITE



SLIMLED MULTI

Convert a standard octagon box or traditional downlight to an LED fixture. Install this CCT Selectable (27 K, 30 K, 35 K, 40 K, 50 K) fixture into a fire rated octagon box to be fire rated. Plus, select your trim finish from one of three included magnetic trims.



SLIMLED MULTI 6"

Perfect for an easy install into slim 3.5"/4" octagon boxes or retrofit into a 6" housing with the 6" retrofit kit. This WET Location Rated fixture, is ideal for use in washrooms, in-suite units, corridors, and more with a Color Temperature Switch below the ceiling to adjust the shade of white.



LUNA FIRE RATED

Perfect lighting fixture for those who prioritize safety, exceptional lighting performance, and stylish design. Its innovative features, including Fire Rated, 0-10v dimming, 1000lm output, 95+ CRI, Color Temperature Selectable 2700K-5000K, and WET location rating, make it the ideal choice for multi-tenant residential or commercial units.




LUNA

Offering quiet optics and impressive performance, the LUNA Series is a user friendly downlight that offers up to 1015 lumens on the 4" model. This shallow, canless fixture has on-site control with a 5-position CCT switch (27 K, 30 K, 35 K, 40 K, 50 K) or a Dim-To-Warm option.



SIGMA

The Sigma 2 Series features a sleek modern look with the broadest offering of trims and shapes, including pinspots, slots, slopes and a best in class wall wash. Add a hex cell louver, a softening or a linear spread lens to further customize optical performance.

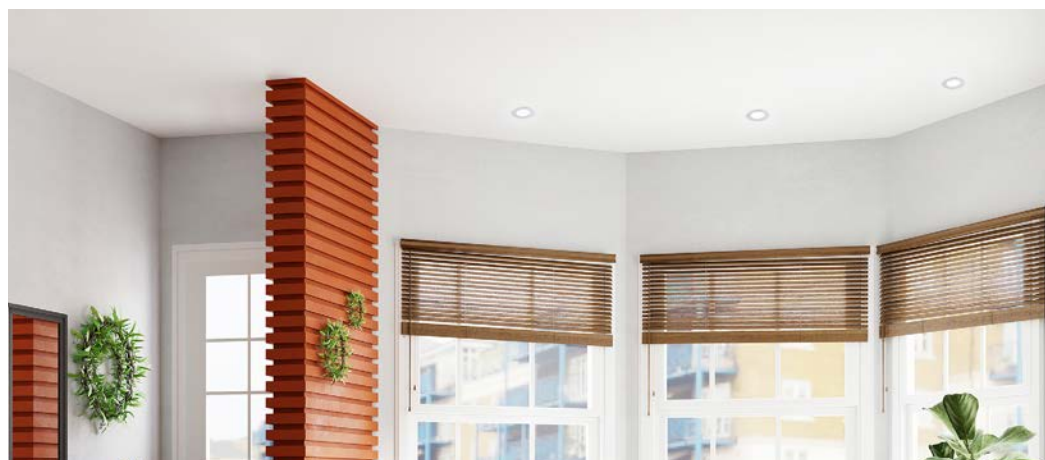



SLIMLED PUCK

With the flexibility to link multiple fixtures together and easily swap the color trim on-site, the SlimLED Puck is thin enough to surface mount, and available for recess installation in millwork. Can be paired with hand wave sensor to control on/off and dimming functionality.



LED TAPE LIGHT

With WET location ratings on some tape light offerings, you can add a subtle glow to your bathroom behind a mirror or under the vanity.



LEDBAR

With 120V and no power supply required, link fixtures to a max of 50ft for continuous diffused lighting in cabinetry and coves.



DELTA, SORA, APOLLO

Integrated LED fixtures in 8W or 10W variants. Offering full rotation, 90° tilt, 30 K and up to 1000 lumens.



DISCLITE

The polycarbonate diffuser lens provides low glare while a selectable CCT switch provides flexibility with 30, 35 and 40K options. Can be easily installed into standard 4" octagon box or an existing 4" housing.

GET THE LOOK

APPLICATION LOBBY



SIGMA

The Sigma 3000, 4000 and 5000 Series offers higher output and larger fixture sizes to meet the functional goals of any commercial space.



LUNA 56 PRO

The LUNA 56 PRO offers unparalleled power with up to 2200 lumens and the ability to fit into both 5" or 6" cut holes. It is ideal for light commercial spaces offering on-site CCT selectability (27, 30, 35, 40, 50 K).



GENESIS

Our Genesis Remodel fixtures are high performance commercial recessed downlights, combining 90 CRI standard high-power LEDs, dimmable driver and high reflectivity spun aluminum reflector. The Genesis Remodel offers easy to access field changeable optics, is WET Location Rated IP66 construction and screw operated vertical adjustment. Comes in a variety of sizes including 4", 6", 8" and 10" that deliver up to 9000lm at 90 CRI.





FORUM

LED Panel providing a modern alternative from traditional troffers. Includes selectable CCT/wattage, auto-sensing voltage, multiple mounting and size options.



TP1VH TAPE WITH CHANNEL

12" high output LED tape light that provides ample illumination. Can be linked for continuous uninterrupted lighting. Install with channel to provide polished appearance that softens light.





SHADE

Combines a decorative frame element with the same industry-leading features of our FORUM LED Panel.



APF CYLINDER

A cylinder or pendant that offers a sleek design, high-lumen output and pendant or surface mounting.



MicroLED

These tiny fixtures, available in round or square, provide directional lighting capability and are available in singles or multiples up to four fixtures in one trim.



MicroPot

Suitable for insulated applications, MicroPots are small fixtures that provide quality illumination for ambient accent lighting in cabinets and millwork.





GET THE LOOK

APPLICATION AMENITIES



LUNA

Offering quiet optics and impressive performance, the LUNA Series is a user friendly downlight that offers up to 1015 lumens on the 4" model. This shallow, canless fixture has on-site control with a 5-position CCT switch (27 K, 30 K, 35 K, 40 K, 50 K) or a Dim-To-Warm option.



DELTA, SORA, APOLLO

Integrated LED fixtures in 8W or 10W variants. Offering full rotation, 90° tilt, 30 K and up to 1000 lumens.



FORUM

LED Panel providing a modern alternative from traditional troffers. Includes selectable CCT/wattage, auto-sensing voltage, multiple mounting and size options.




SLIMLED PUCK

With the flexibility to link multiple fixtures together and easily swap the color trim on-site, the SlimLED Puck is thin enough to surface mount, and available for recess installation in millwork. Can be paired with hand wave sensor to control on/off and dimming functionality.



LEDBAR

With 120V and no power supply required, link fixtures to a max of 50ft for continuous diffused lighting in cabinetry and coves.

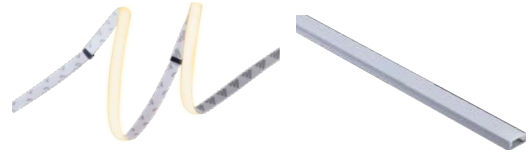

TP1VH TAPE WITH CHANNEL

12" high output LED tape light that provides ample illumination. Can be linked for continuous uninterrupted lighting. Install with channel to provide polished appearance that softens light.



MicroLED

These tiny fixtures, available in round or square, provide directional lighting capability and are available in singles or multiples up to four fixtures in one trim.



MicroPot

Suitable for insulated applications, MicroPots are small fixtures that provide quality illumination for ambient accent lighting in cabinets and millwork.

GET THE LOOK

APPLICATION CORRIDORS



FORUM

LED Panel providing a modern alternative from traditional troffers. Includes selectable CCT/wattage, auto-sensing voltage, multiple mounting and size options.



 
SHADE

Combines a decorative frame element with the same industry-leading features of our FORUM LED Panel.



SIGMA

The Sigma 2 Series features a sleek modern look with the broadest offering of trims and shapes, including pinspots, slots, slopes and a best in class wall wash. Add a hex cell louver, a softening or a linear spread lens to further customize optical performance.







LUNA

Offering quiet optics and impressive performance, the LUNA Series is a user friendly downlight that offers up to 1015 lumens on the 4" model. This shallow, canless fixture has on-site control with a 5-position CCT switch (27 K, 30 K, 35 K, 40 K, 50 K) or a Dim-To-Warm option.



LUNA 56 PRO

The LUNA 56 PRO offers unparalleled power with up to 2200 lumens and the ability to fit into both 5" or 6" cut holes. It is ideal for light commercial spaces offering on-site CCT selectability (27, 30, 35, 40, 50 K).



DISCLITE

The polycarbonate diffuser lens provides low glare while a selectable CCT switch provides flexibility with 30, 35 and 40K options. Can be easily installed into standard 4" octagon box or an existing 4" housing.





 **Liteline**

Private Residence, California

Liteline Corporation
Copyright © 2023
All rights reserved.

Telephone
416.996.1856
1.866.730.7704

Fax
905.709.5255
1.888.738.9736

LITELINE.COM

REV 05.01.2023
M-MULTIUNITRESI-E

