

USA & CANADA

Flat, Sticks, Top, Brisa

VIBIA

VIBIA

New Collections

Flat
6

Sticks
36


Top
66

Brisa
82

Flat

Design by Ichiro Iwasaki.

Flat's distinctive, disc-shaped diffusers form horizontal planes of light that integrate with the surrounding architecture. A study in geometry, the collection creates layers of light that infuse a space with a soothing, Zen sensibility.

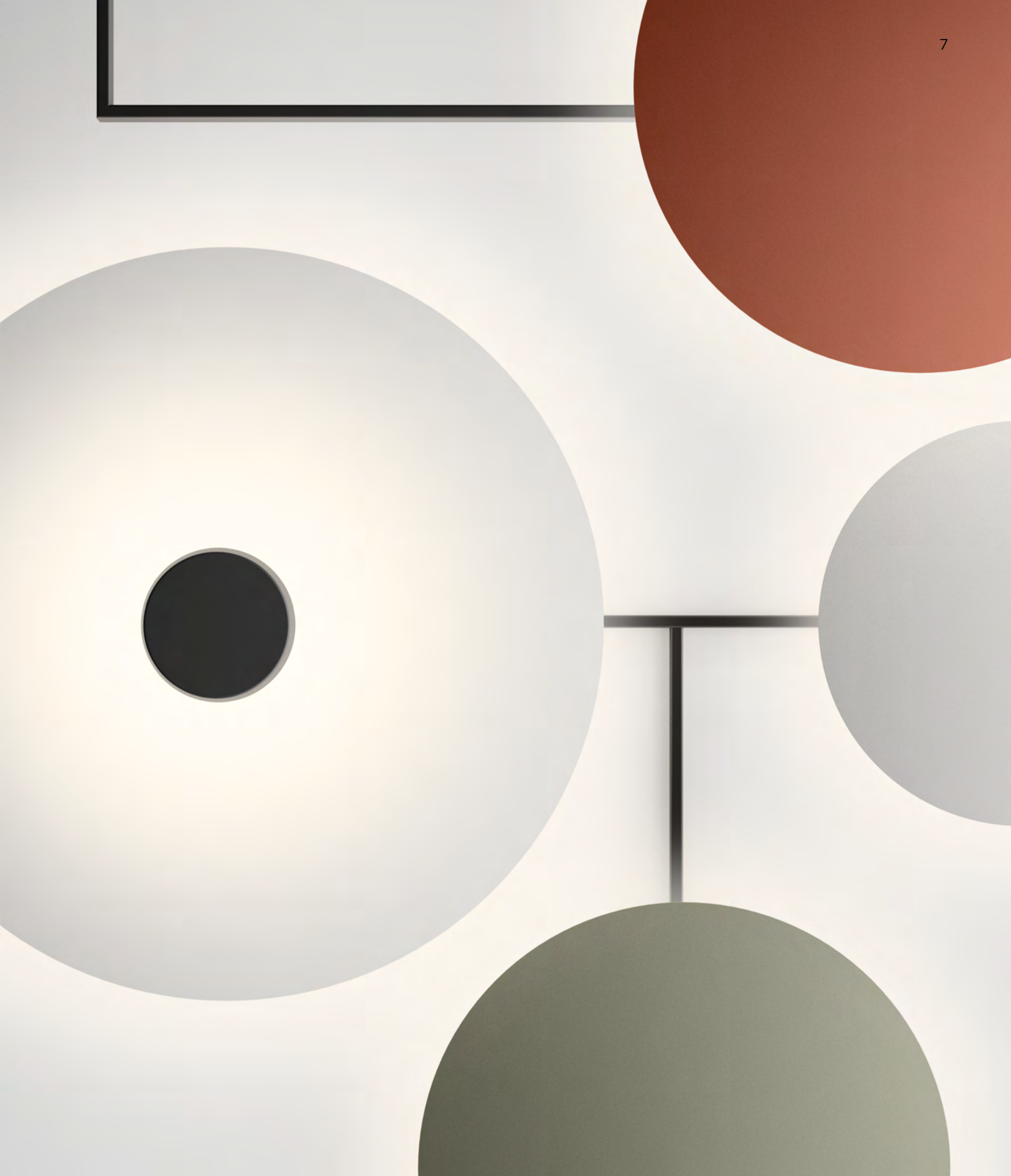










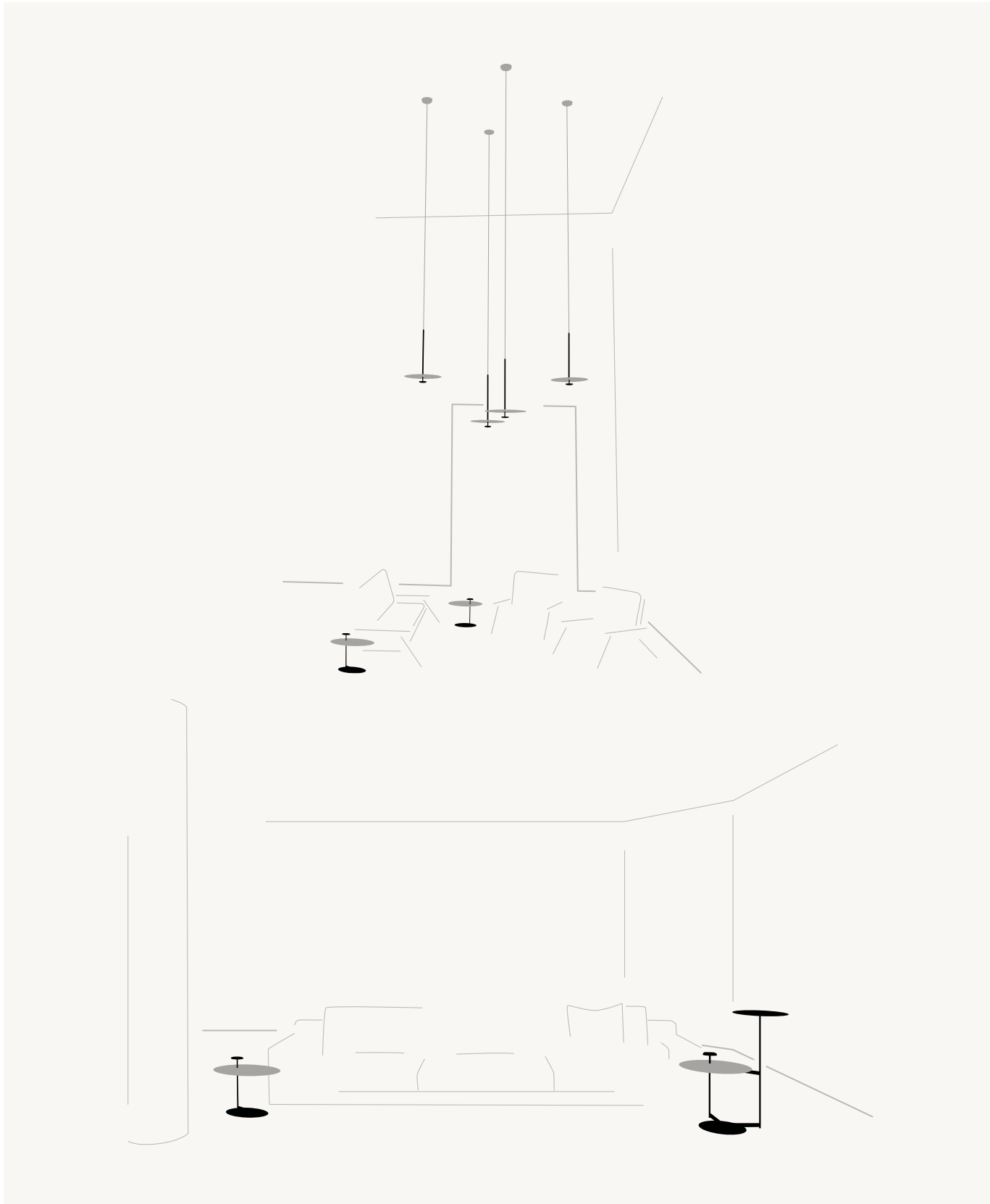



Ref. 5945
One general on/off and dimming
switch for both discs.



The LED-powered collection features flat metal plates reflecting light off their surface, casting an enveloping, wraparound glow that appears illuminated from within.

The floor lamp comes in small and large sizes, with a single or double plate - either a compact disc or a shelf-like plate that doubles as furniture. When deployed in pairs, the smaller, complementary disc captures and reflects light back at the larger plate, creating pockets of soft, pooled indirect light that illuminate both the space and the surface itself.

Ref. 5945.

- 13 Grey L1 (NCS S 1000-N)
- 47 Green L1 (NCS S 4005-G80Y)

Ref. 5950.

- 10 White (NCS S 0300-N)

Shade: Aluminum.

Diffuser: Polycarbonate.

Structures: Steel.

LED 2700 K. CRI>90

Dimming: Push.



Ref. 5945

One general on/off and dimming switch for both discs.



Personalization options available

- LED 3000K, 3500K.

Request more information.


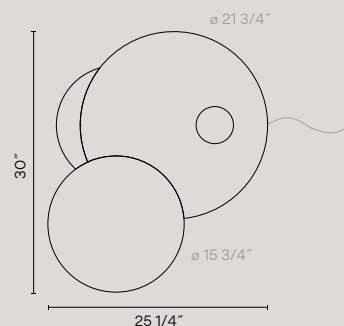
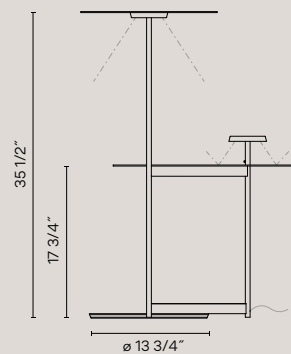


5945

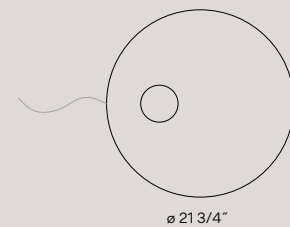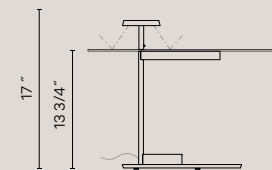

5950



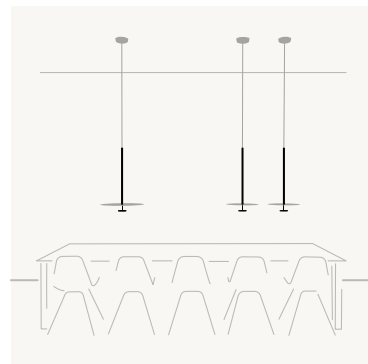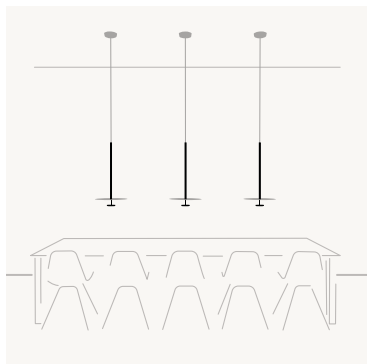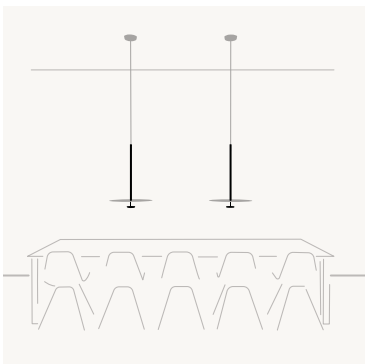

FLAT














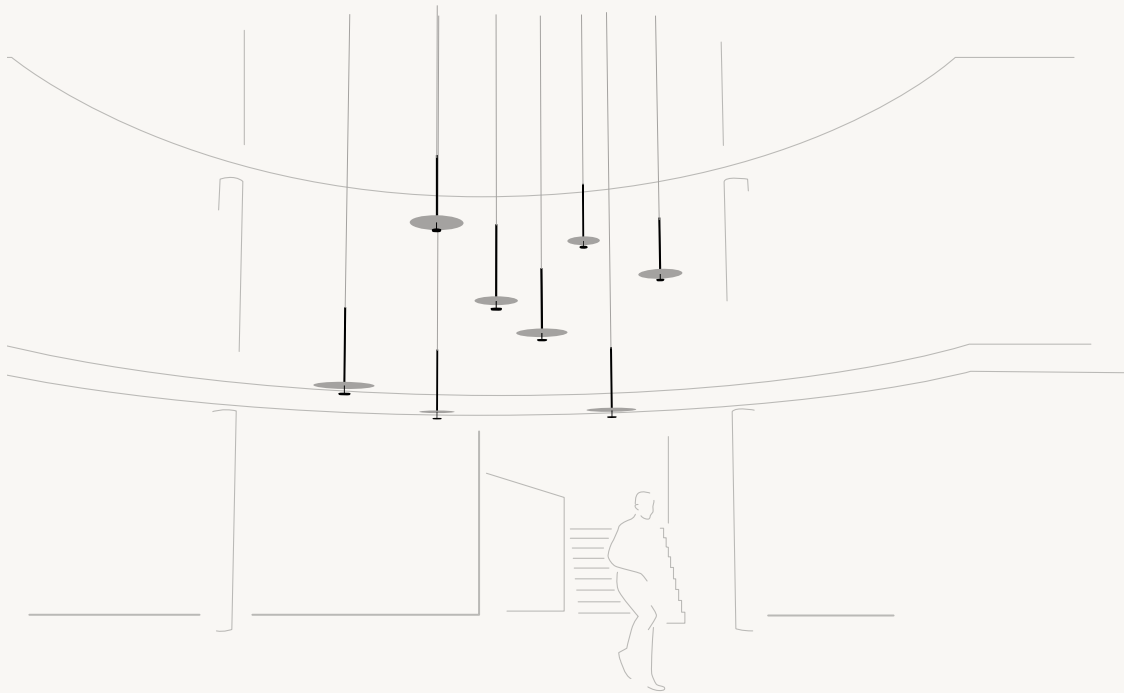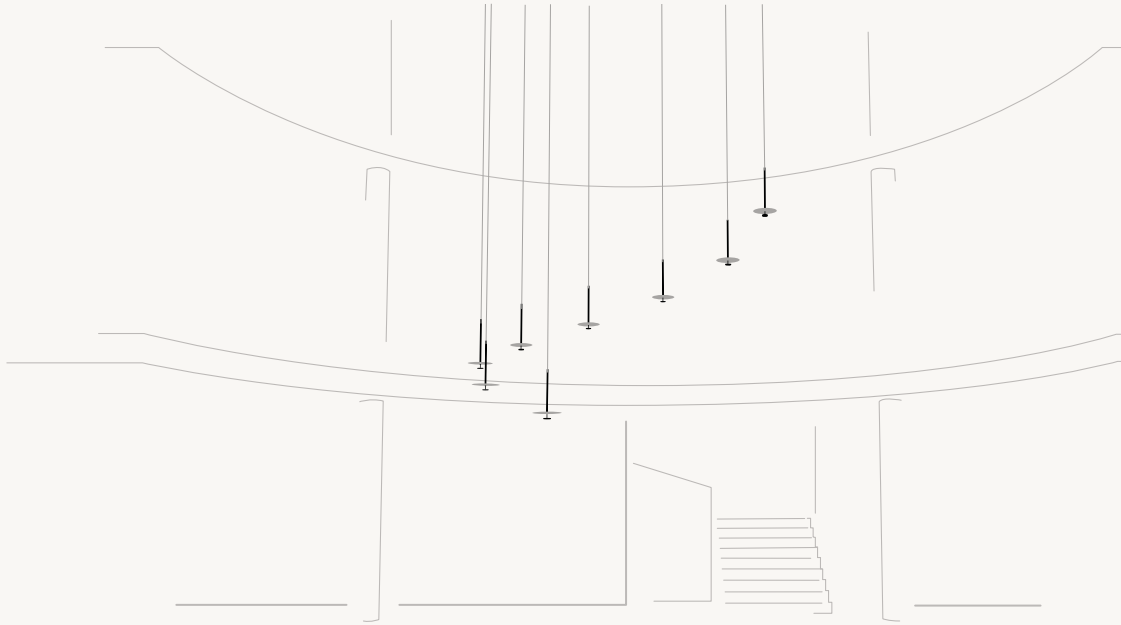

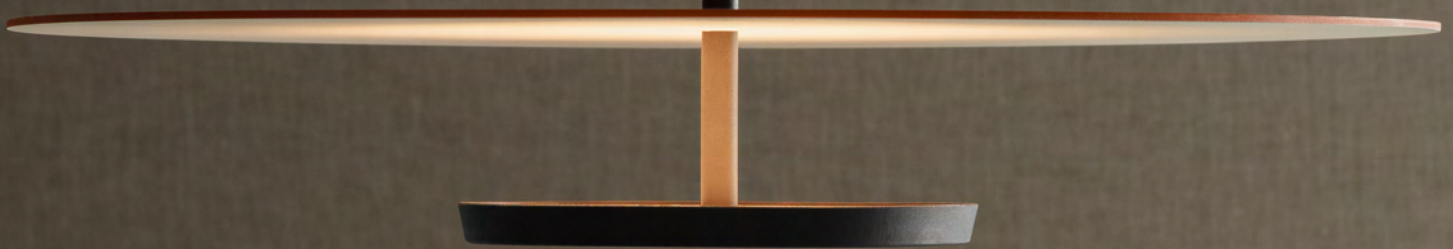

The collection features flat metal plates positioned at different heights. They reflect light from their surface, casting an enveloping, wraparound glow that appears illuminated from within. Suspended by a cable from the ceiling, the pendants are at once delicate and graphic, seeming to float overhead. The small disc reflects light back at the larger disc, creating a pocket of soft, pooled indirect light.


- 13 Grey L1 (NCS S 1000-N)
- 37 Terra Red (NCS S 4040-Y70R)
- 47 Green L1 (NCS S 4005-G80Y)

Shade: Aluminum.
 Diffuser: Polycarbonate.
 Structures: Steel.
 Canopy: Aluminum.

LED 2700 K. CRI>90
 Dimming: 0-10V

Personalization options available

- LED 3000K, 3500K.
 - Extra cable length
 - Dimming: DALI, TRIAC, LUTRON ECO
- Request more information.

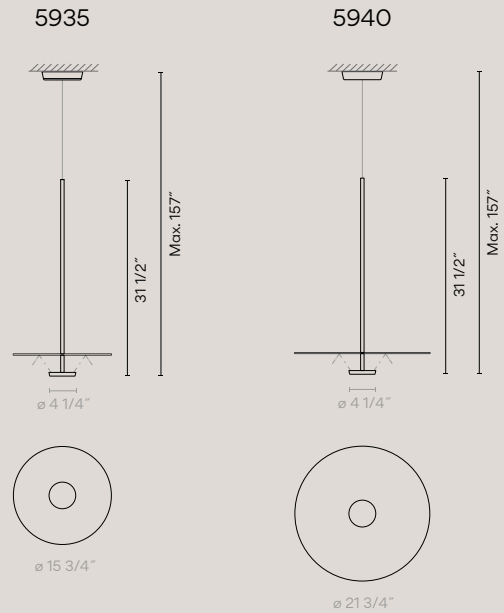

Upper side of the disc available in:
 Grey L1, Terra Red, or Green L1.












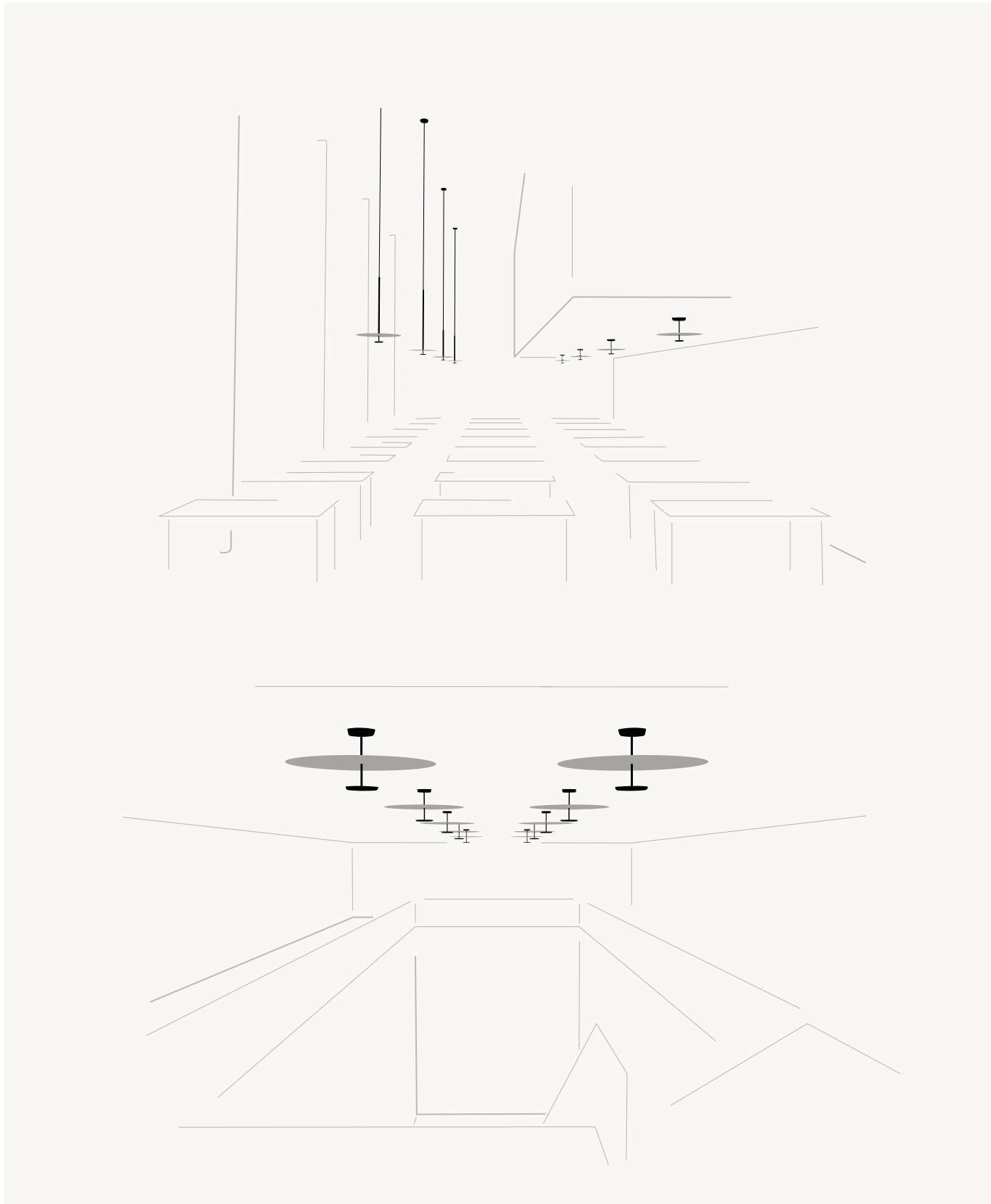







The LED-powered collection is composed of flat metal plates positioned at different heights. The plate surfaces reflect light, casting an enveloping, wraparound glow that appears illuminated from within. At once delicate and graphic, the ceiling light seems to float overhead. It comes in small or large sizes with a single or double disc. The single-disc style reflects indirect light up towards the ceiling, while the double disc's smaller, complementary plate captures and reflects light back at the larger disc, creating a pocket of soft, pooled indirect light.

Ref. 5922.

10 White (NCS S 0300-N)



71 White, Green L1, Grey L1
(NCS S 0300-N, NCS S 4005-G80Y,
NCS S 1000-N)

Ref. 5924.

10 White (NCS S 0300-N)



72 White, Green L1
(NCS S 0300-N, NCS S 4005-G80Y)

73 White, Grey L1

(NCS S 0300-N, NCS S 1000-N)

Ref. 5926, 5915.

10 White (NCS S 0300-N)

Shade: Aluminum.

Diffuser: Polycarbonate.

Structures: Steel.

Canopy: Aluminum.

LED 2700 K. CRI>90

Dimming: 0-10V

* Electrical connection point.

Personalization options available

- LED 3000K, 3500K.


-Dimming: TRIAC, DALI

Ref. 5915


-Dimming: TRIAC, DALI, LUTRON ECO

Request more information.


5922

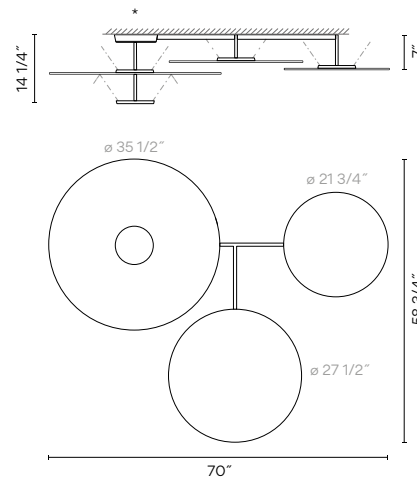


5924

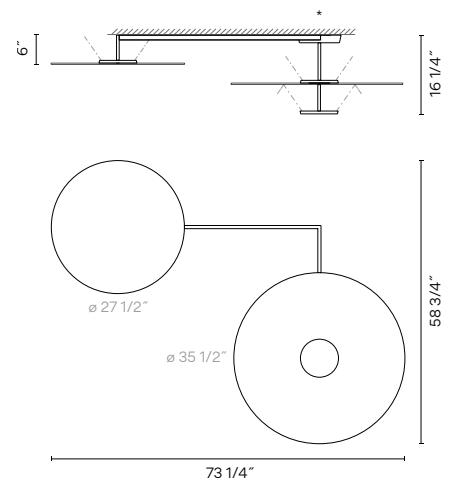

5926

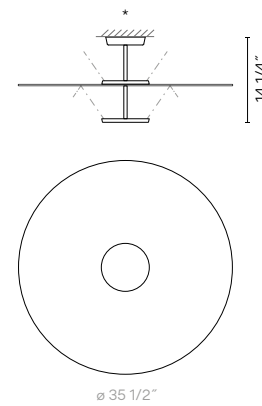

5915

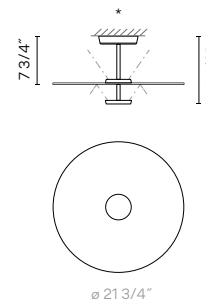

CEILING



“A reflector lamp collection that connects a floating light source with a linear structure. Minimal reflector discs and linear structure provide simple and powerful universality like alphabets and musical scores”.

Ichiro Iwasaki

Sticks

Design by Arik Levy.

Fusing technology, space, and architecture, Sticks offers a creative toolkit for integrating light elements in an interior. Pure and graphic, the minimalist aluminum rods transform linear light into floating sculpture.



















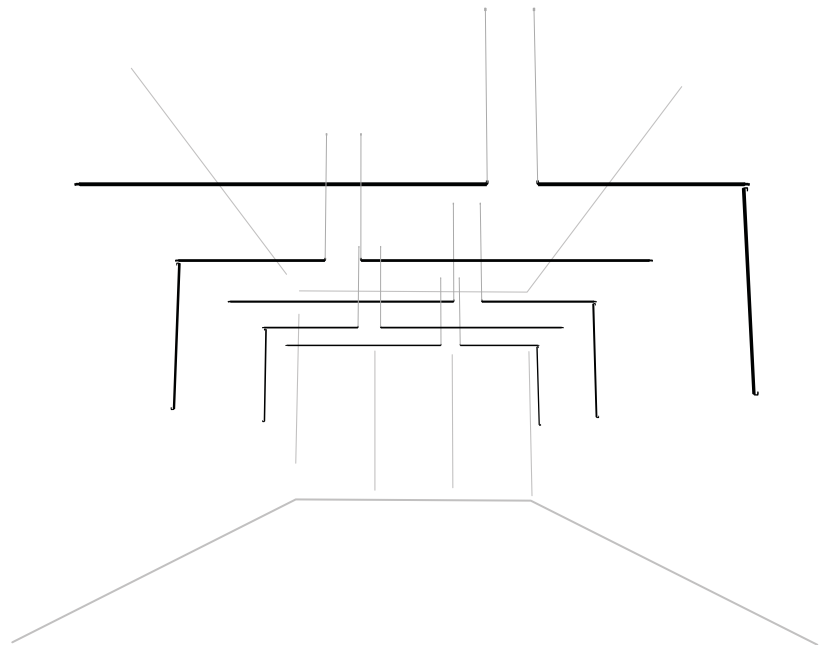



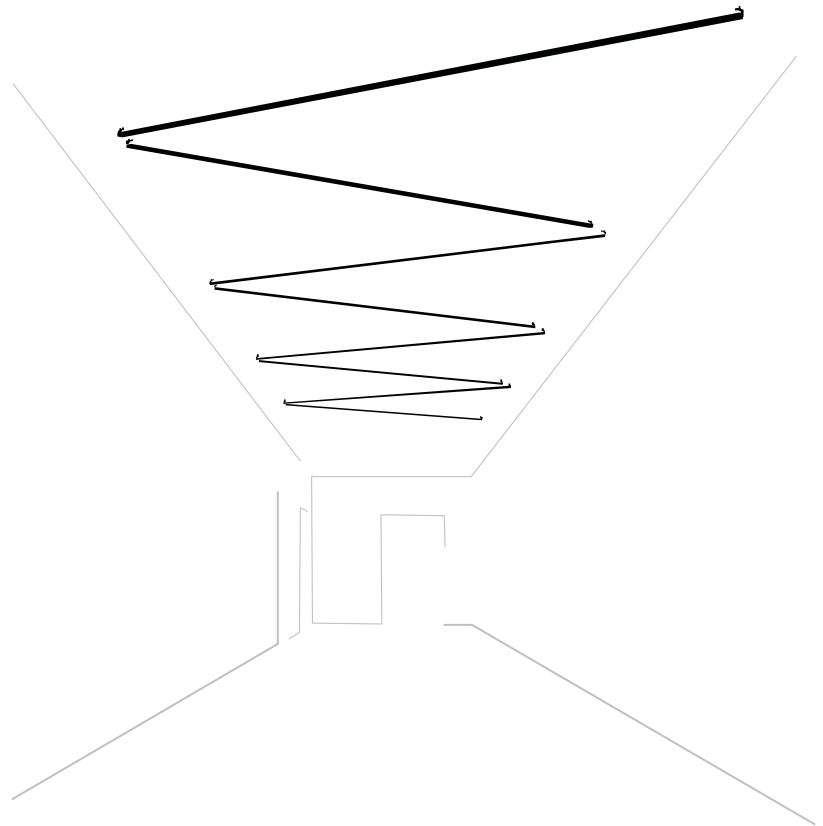



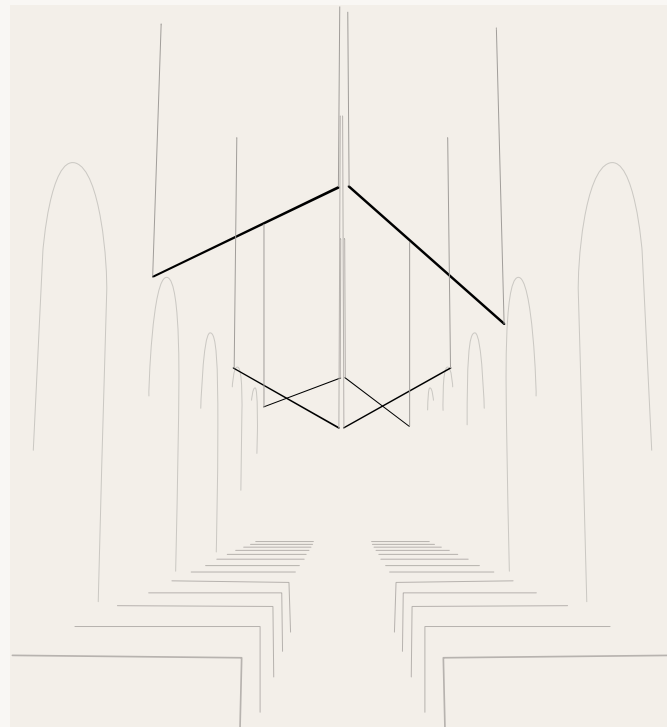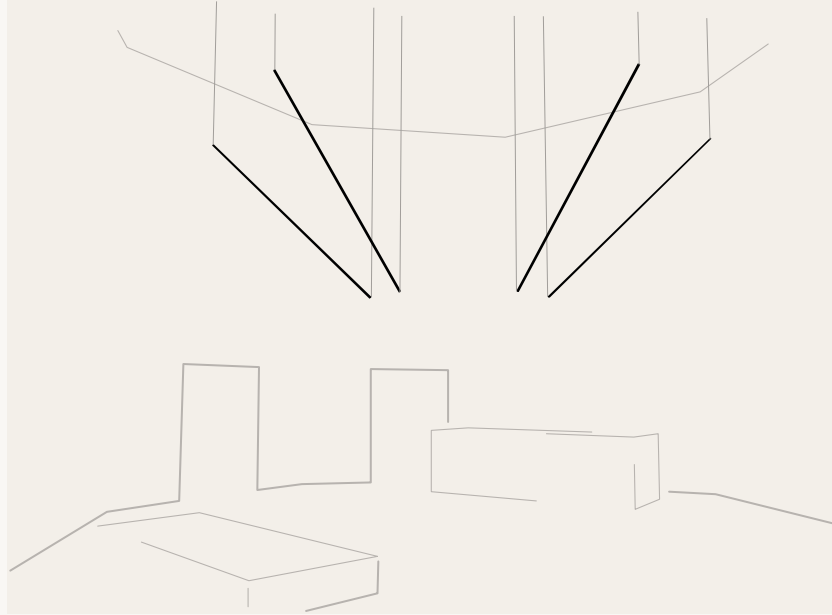














Horizontal pendant version
with a UGR index <math><19</math> available

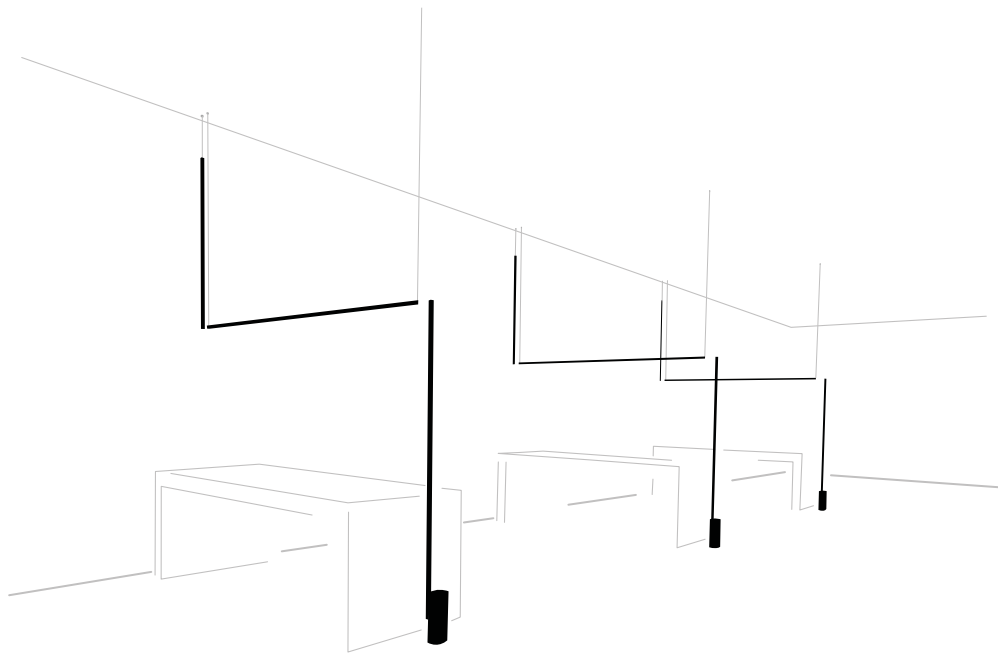

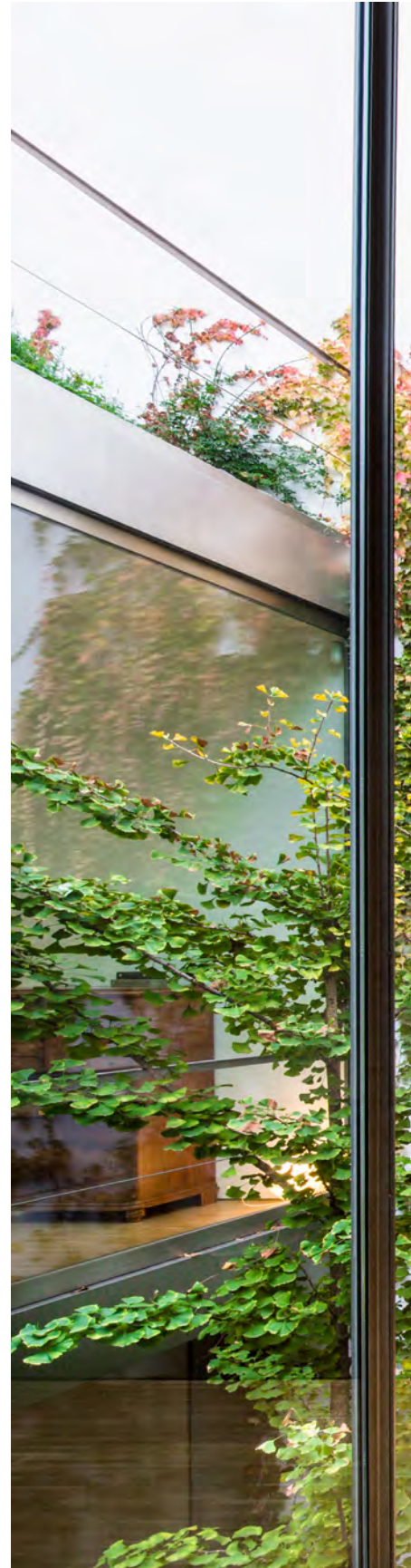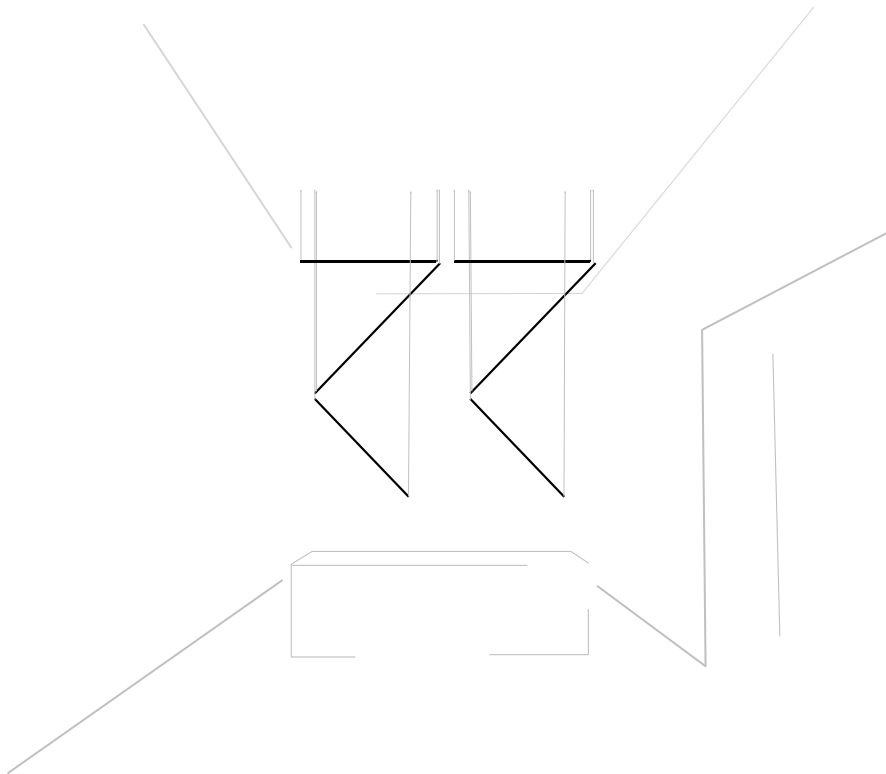











“The professionals see the space differently from others. Sticks become their **Lighting Toolkit** to create whatever they think is correct because they know the space they are working on”.

 Arik Levy

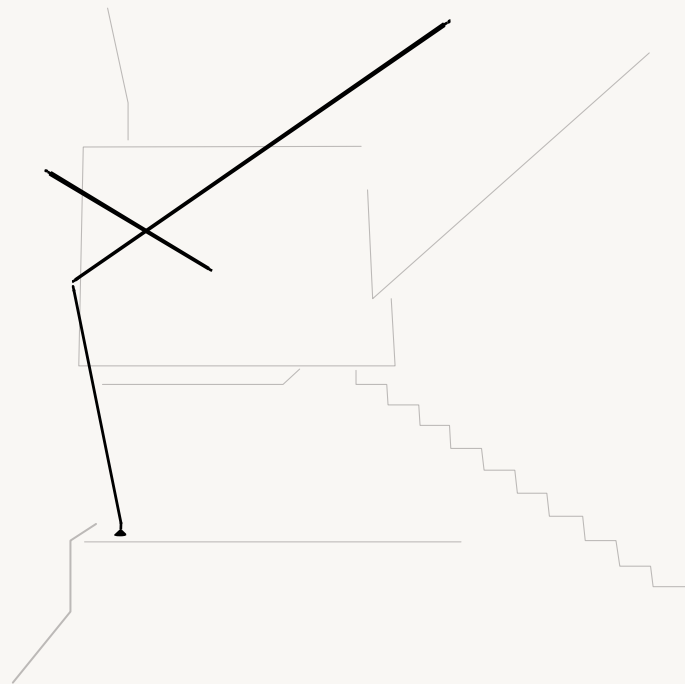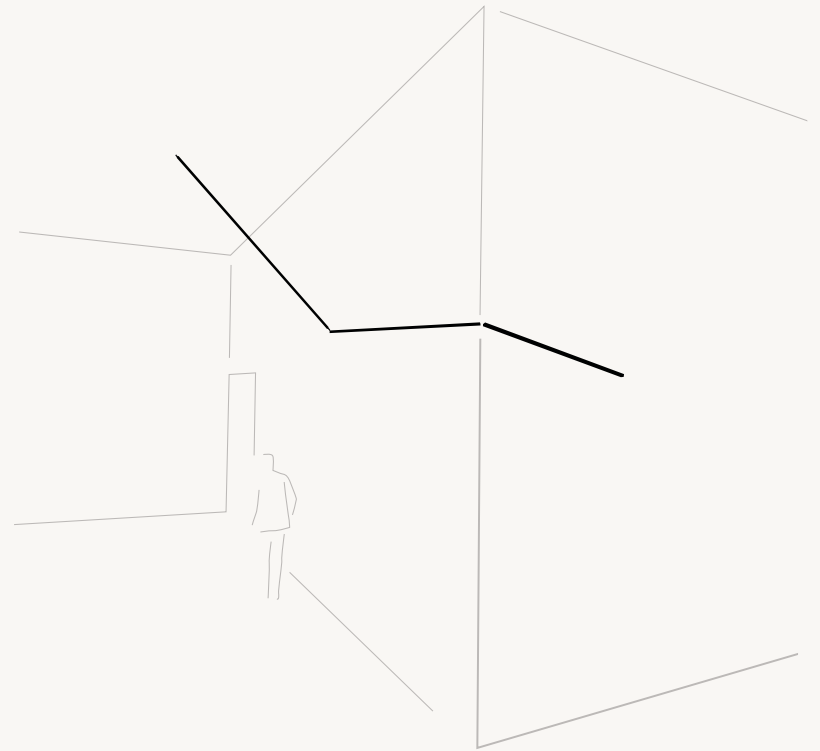

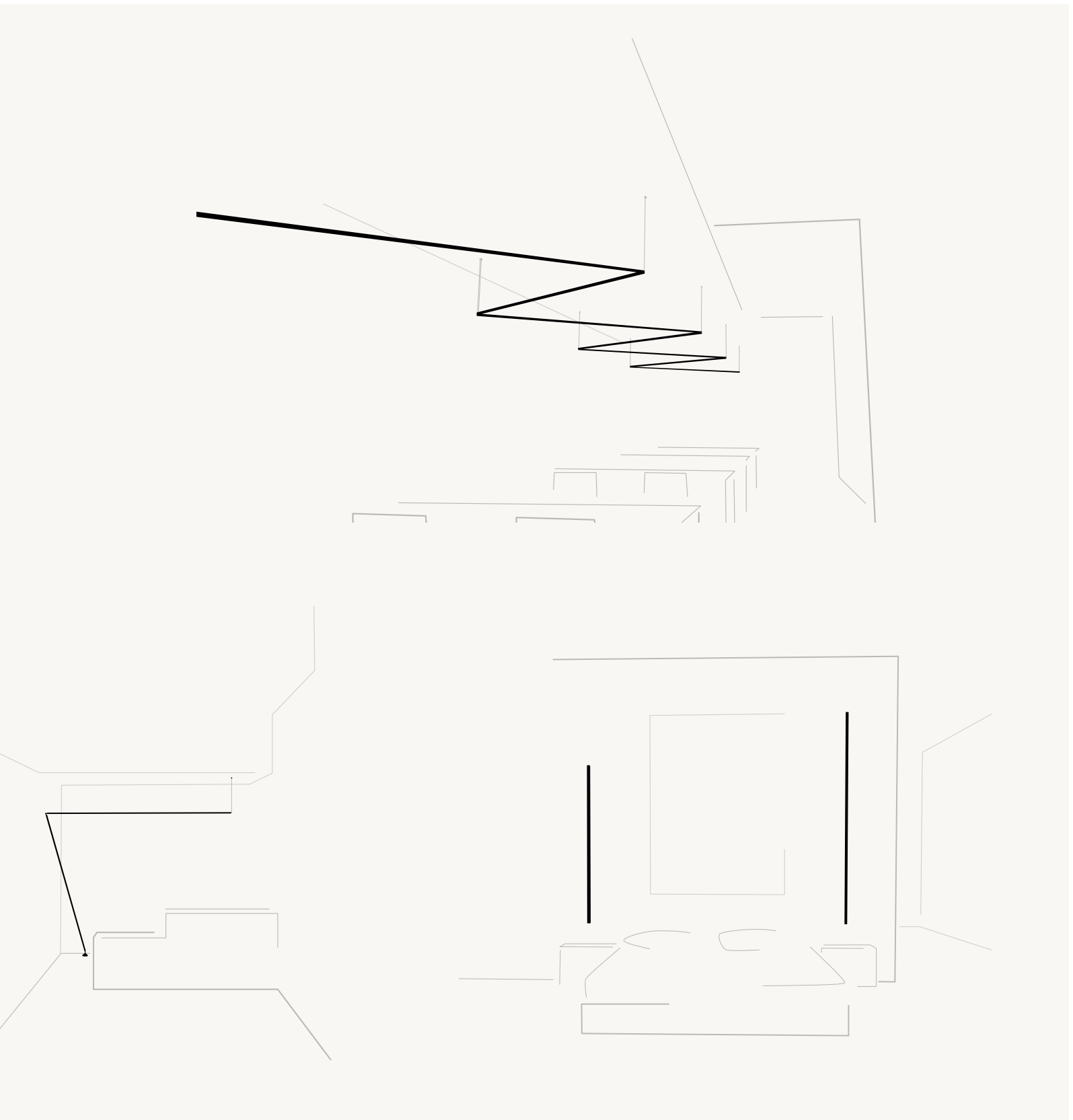





One solution for every space

You can create your own layout adding connectable sticks or stand-alone model to your composition.

● 11 Black (NCS S 8500-N)

Sticks: Aluminum.
Diffuser: Polycarbonate.

LED 2700 K / 3500 K. CRI>90


Dimming:
Floor base & plug: Push.
Surface canopy,
Remote driver recessed micro canopy: 1-10V.

Ref. 7338, 7339 and 7348
Dimming: Push.

Personalization options available

- Configuration layout at vibia.com
 - LED 3000 K
 - Surface canopy dimming: DALI
 - Remote driver recessed micro canopy: DALI, TRIAC, LUTRON ECO
 - Extra cable length: Pendant sticks
- Request more information.

Stand-alone
Floor

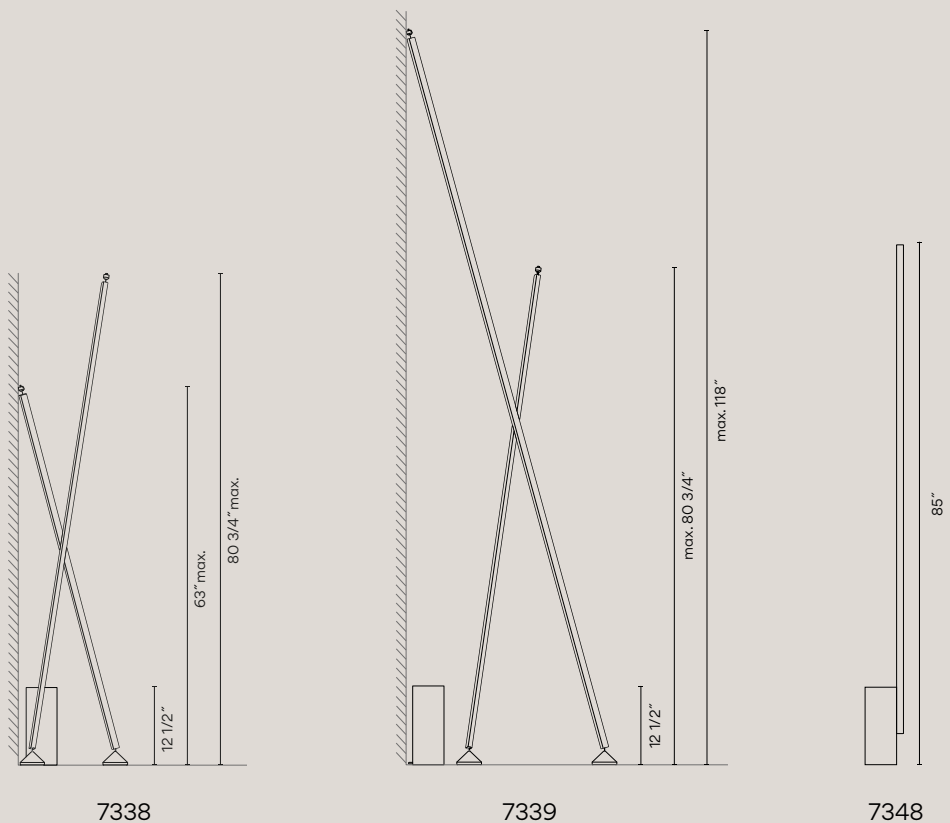

Connecting space application

Custom configurations include ceiling-to-ceiling, wall-to-wall, floor-to-wall, wall-to-ceiling, or suspended from the ceiling into open space. Through their physical form and the light they cast, they create and disrupt architectural planes.

Connectable

The Sticks collection has three sizes: 59", 78 3/4", or 118", and they can be connected to each other to a total maximum length of 177 inches per electrical connection.


59"

78 3/4"

118"




Sticks are connected one to each other with a 6 inch length cord.

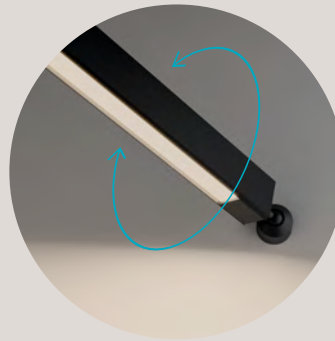


Each stick rotates on its own axis, allowing light to be directed precisely where needed.

Floor
Floor-to-Wall
Stand-alone

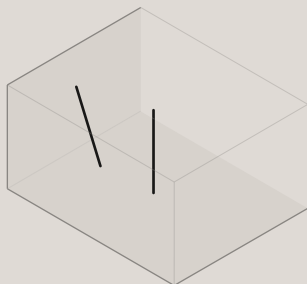


+

Ceiling / Wall
Ceiling-to-Ceiling
Wall-to-Wall
Wall-to-Wall (corner)
Wall-to-Ceiling

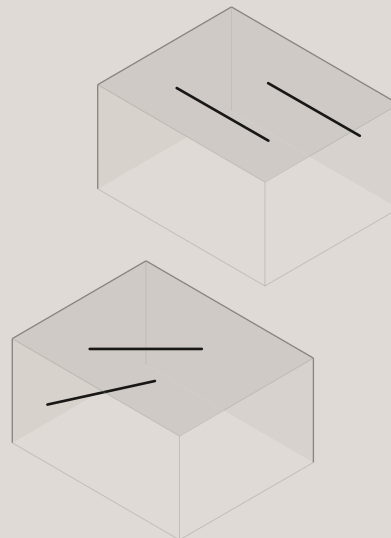

+

Pendants
Wall-to-Pendant
Ceiling-to-Pendant
Vertical

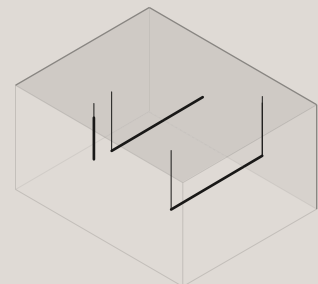




Create your own composition easy and quick at vibia.com selecting the option that best fits your needs.

A


Choose among pre-designed layouts based in multiple applications and spaces.

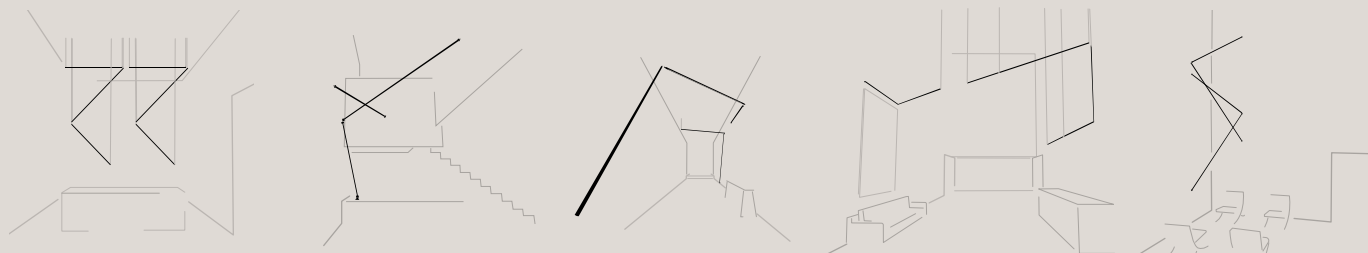

B

Adjust a pre-designed layout to your project by modifying:

- + Length of the sticks.
- + Position of each stick in the space.
- + Color temperature and dimming.
- + Installation type.

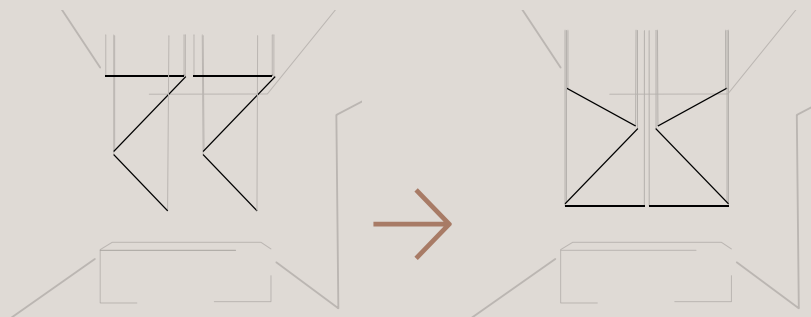

C

Create your connectable Sticks configuration from scratch in three easy steps, without sketches.

1

Choose the location for your electrical connection point



2

Add connectable Sticks up to 177 inches



3

Configure

- + Color temperature
- + Dimming control
- + Installation type
- + Pendant height



Top

 






Design by Ramos & Bassols.

Soft, spherical shapes and a warm luminescence characterize the Top collection. Its glowing epicenter is encircled by a larger ring, lending the look of framing the light within its pure geometry.







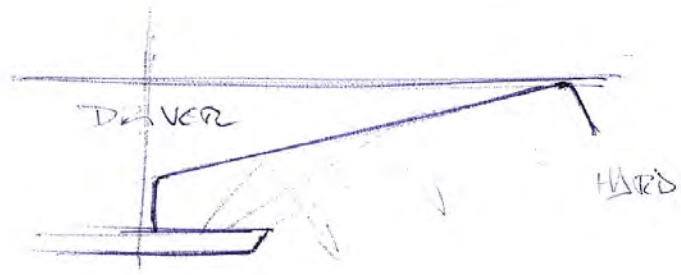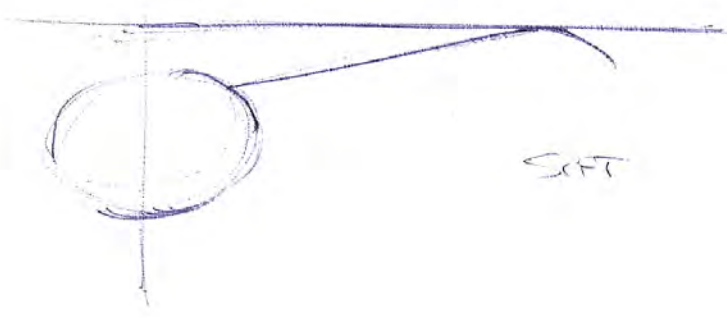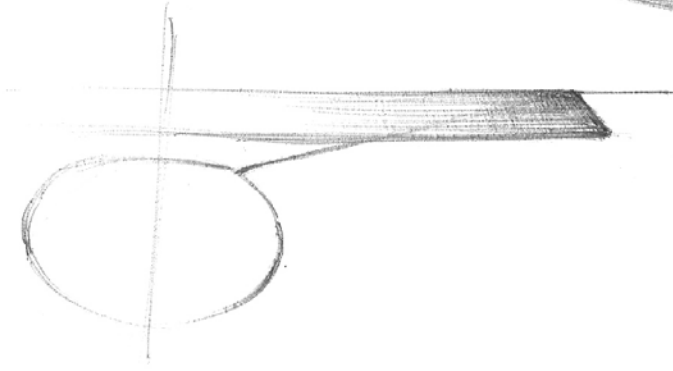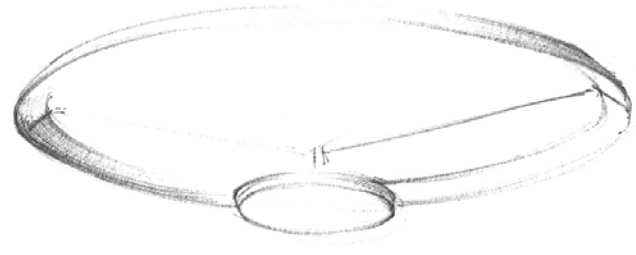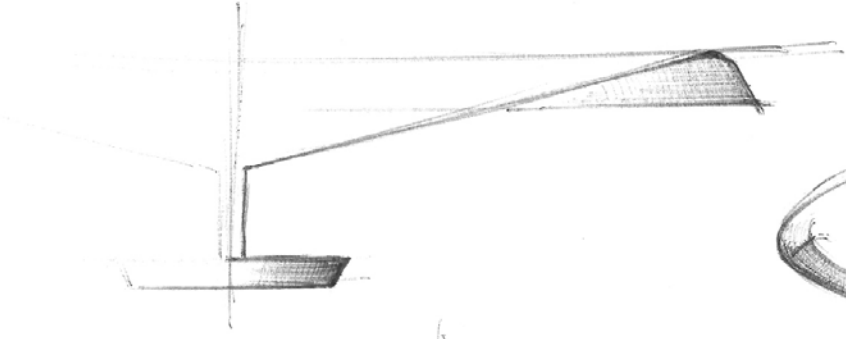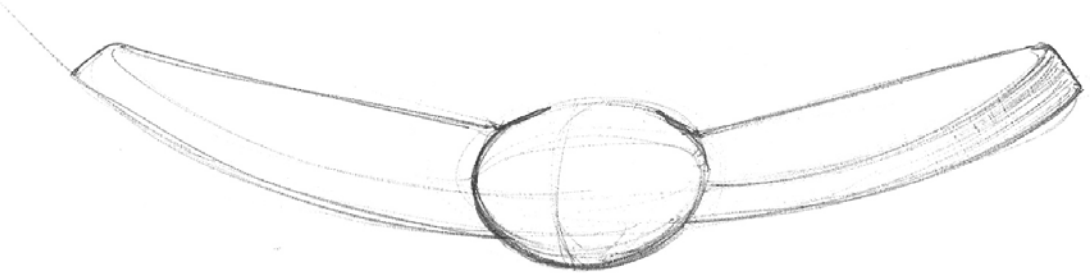













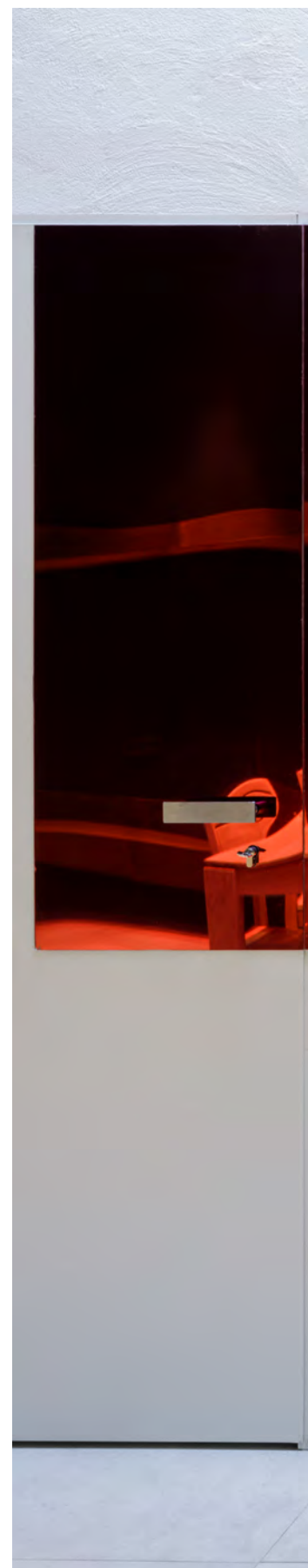





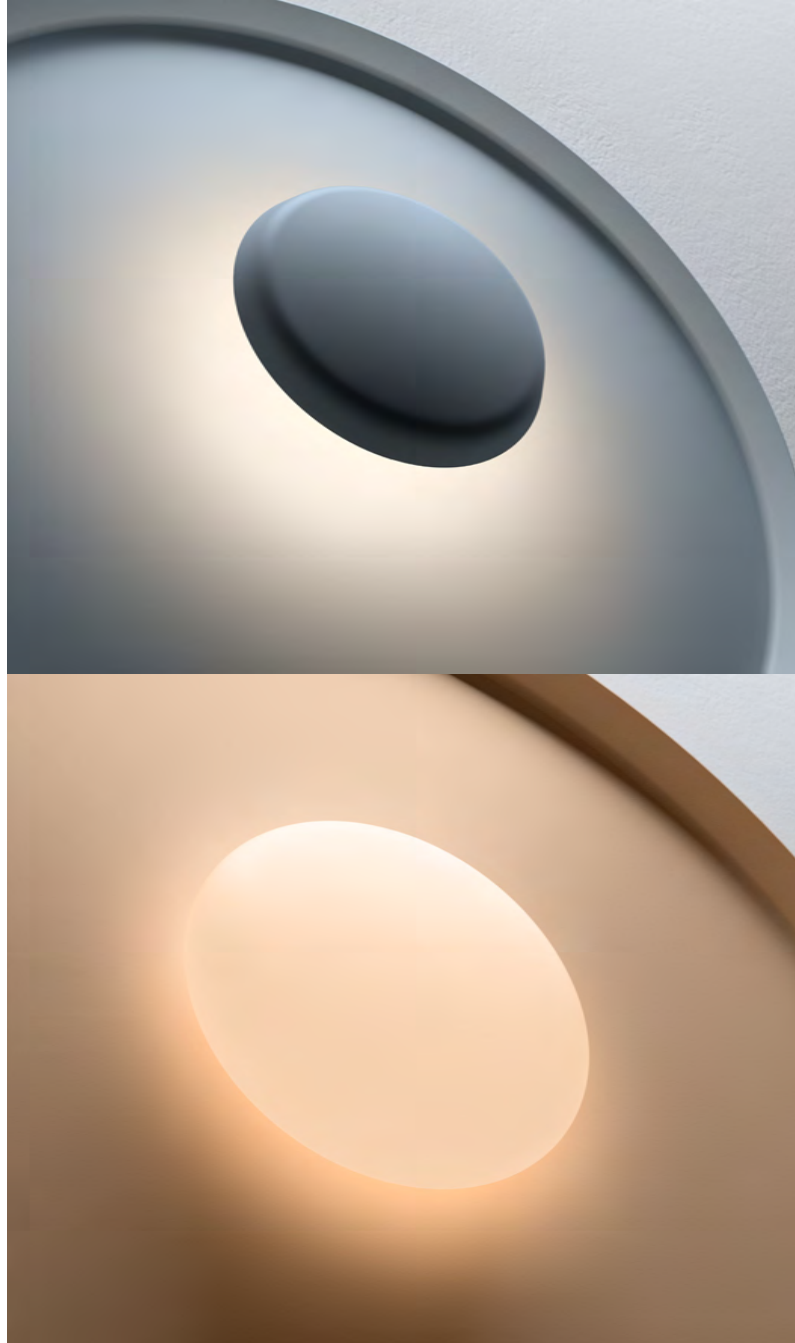



A modern reimagining of the timeless rosette motif, the Top ceiling and wall lights are distilled to its essence. A pair of simple circles creates a focal point of LED-powered light overhead that recalls a bullseye pulsing with a soft glow. Its small, illuminated sphere reflects light back towards the larger one, generating a halo effect of even, indirect light and a soothing ambiance. The ceiling and wall lights are crafted of aluminum and available in mini, small, medium, and large sizes, the latter fitted with a glass diffuser that emits general, direct light.

- 10 White (NCS S 0300-N)
- 36 Soft Pink (NCS S 1010-Y50R)
- 40 Blue L1 (NCS S 3010-B)
- 47 Green L1 (NCS S 4005-G80Y)

Body: Aluminum.

Ref. 1170.

Diffuser: Triplex Opal Glass.

LED 2700 K. CRI>90

Ref. 1155, 1160, 1170

Dimming: DALI, 1-10V, Push.

Personalization options available

- LED 3000K, 3500K.

Ref. 1154


- Remote Driver Dimming: 1-10V, DALI, LUTRON ECO

Ref. 1155, 1160


- Dimming: TRIAC, LUTRON ECO

Request more information.


1170

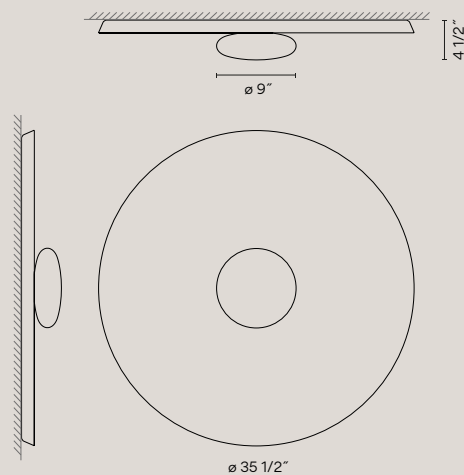

1160

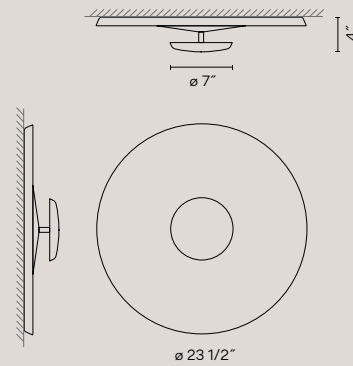

1155

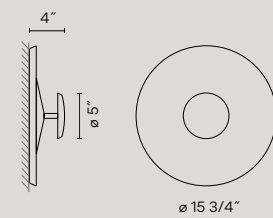

1154



Brisa

Design by Lievore, Altherr, Molina.

Inspired by the forest blue bell flower, Brisa adds a nature-inspired accent to any outdoor space. Its long, slender stem is topped with a hanging, conical shade and features adjustable, revolving arms.





Brisa adds a nature-inspired accent to any space. True to its name, which means breeze in Spanish, Brisa's silhouette is delicate and graceful. Its long, slender stem is topped with a hanging, conical shade that beautifully captures the bloom's languid look. The simple architecture and distinctive bowed head lend it a quiet presence that accents an outdoor space rather than overpowering it. Offered with 1 or 3 arms, it resembles a solitary plant or grouping of flowers in a natural setting. The LED-powered light source casts a warm, bright beam, making it ideal for focused illumination. The collection is available in a recessed style.

- 07 Khaki (RAL 7039)
- 54 Oxide (RAL 8014)


Shade: Aluminum.
 Base: Aluminum.
 Disc: Stainless steel.
 Tube: Steel.

LED 2700K. CRI>90. 95 lm/W.

Ground mounted recessed.

Personalization options available

- LED 3000K, 3500K.
 - Remote driver dimming: DALI, LUTRON ECO
- Request more information.

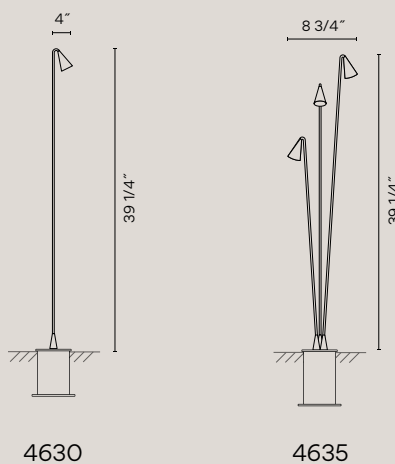



Flat

Design by Ichiro Iwasaki.

Floor



5945 p.15



5950 p.15

5945

2 x LED PLATE 7W 400mA.

LED 2700 K. CRI >90. 2400 lm. 171.4 lm/W.

Driver Constant Voltage 24V. 100-240V. 50/60Hz.

Dimming: Push.

Personalization options available

- LED 3000K, 3500K.

Request more information.

Shade: Aluminum.

Diffuser: Polycarbonate.

Structures: Steel.

5945-13 /15 Grey L1 (NCS S 1000-N)

5945-47 /15 Green L1 (NCS S 4005-G80Y)

LED IP20 cULus PUSH 120V

5950

1 x LED PLATE 7W 400mA.

LED 2700 K. CRI >90. 1200 lm. 171.4 lm/W.

Driver Constant Voltage 24V. 100-240V. 50/60Hz.

Dimming: Push.

Personalization options available

- LED 3000K, 3500K.

Request more information.

Shade: Aluminum.

Diffuser: Polycarbonate.



Structures: Steel.

5950-10 /15 White (NCS S 0300-N)

LED IP20 cULus PUSH 120V

Pendants

* Upper side of the disc available in:
Grey L1, Terra Red, or Green L1.

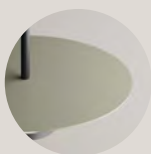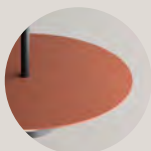

ø 15 3/4"

5935 p. 25



ø 21 3/4"

5940 p. 25

5935

1 x LED PLATE 10.5 W 700 mA.

LED 2700 K. CRI >90. 1353 lm. 128.88 lm/W.

Driver Constant current 700 mA. 120~277V. 50/60Hz.

Dimming: 0-10V.

Personalization options available

- LED 3000K, 3500K.

- Dimming: DALI, TRIAC, LUTRON ECO

- Extra cable length.

Request more information.

Shade: Aluminum.

Diffuser: Polycarbonate.

Structures: Steel.

Cnopy: Aluminum.

5935-13 /12 Grey L1 (NCS S 1000-N)

5935-37 /12 Terra Red (NCS S 4040-Y70R)

5935-47 /12 Green L1 (NCS S 4005-G80Y)

LED IP20  0-10V Multi-volt

5940

1 x LED PLATE 10.5 W 700 mA.

LED 2700 K. CRI >90. 1353 lm. 128.88 lm/W.

Driver Constant Current 700mA. 120~277V. 50/60Hz.

Dimming: 0-10V.

Personalization options available

- LED 3000K, 3500K.

- Dimming: DALI, TRIAC, LUTRON ECO

- Extra cable length.

Request more information.

Shade: Aluminum.

Diffuser: Polycarbonate.

Structures: Steel.

Cnopy: Aluminum.

5940-13 /12 Grey L1 (NCS S 1000-N)

5940-37 /12 Terra Red (NCS S 4040-Y70R)

5940-47 /12 Green L1 (NCS S 4005-G80Y)

LED IP20  0-10V Multi-volt

Ceiling



ø 21 3/4"

5915 p. 34



ø 35 1/2"

5926 p. 34

5915

2 x LED PLATE 10.5 W 700mA.
LED 2700 K. CRI >90. 2706 lm. 128.88 lm/W.
Driver Constant current 700 mA. 120~277V. 50/60Hz.
Dimming: 0-10V.

Personalization options available

- LED 3000K, 3500K.
 -Dimming: TRIAC, DALI, LUTRON ECO
 Request more information.

Shade: Aluminum.
 Diffuser: Polycarbonate.
 Structures: Steel.
 Canopy: Aluminum.

5915-10 /12 White (NCS S 0300-N)

LED IP20   Multi-volt

5926

2 x LED PLATE 20 W 700mA.
LED 2700 K. CRI >90. 5568 lm. 139.20 lm/W.
Driver Constant Current 700 mA. 120~277V. 50/60Hz.
Dimming: 0-10V.

Personalization options available

- LED 3000K, 3500K.
 -Dimming: TRIAC, DALI.
 Request more information.

Shade: Aluminum.
 Diffuser: Polycarbonate.
 Structures: Steel.
 Canopy: Aluminum.

5926-10 /12 White (NCS S 0300-N)

LED IP20   Multi-volt

Ceiling



70" x 58 3/4"

5922 p. 34



73 1/4" x 58 3/4"

5924 p. 34

5922

4 x LED PLATE 20 W 700mA.

LED 2700 K. CRI >90. 11136 lm. 139.20 lm/W.

Driver Constant current 700 mA. 120-277V. 50/60Hz.

Dimming: 0-10V.

Personalization options available

- LED 3000K, 3500K.

- Dimming: TRIAC, DALI.

Request more information.

Shade: Aluminum.
 Diffuser: Polycarbonate.
 Structures: Steel.
 Canopy: Aluminum.

5922-10 /12 White (NCS S 0300-N)

5922-71 /12 White, Green L1, Grey L1

(NCS S 0300-N, NCS S 4005-G80Y, NCS S 1000-N)

LED IP20  0-10V Multi-volt

5924

3 x LED PLATE 20 W 700mA.

LED 2700 K. CRI >90. 8352 lm. 139.20 lm/W.

Driver Constant Current 700 mA. 120-277V. 50/60Hz.

Dimming: 0-10V.

Personalization options available

- LED 3000K, 3500K.

- Dimming: TRIAC, DALI.

Request more information.

Shade: Aluminum.
 Diffuser: Polycarbonate.
 Structures: Steel.
 Canopy: Aluminum.

5924-10 /12 White (NCS S 0300-N)

5924-72 /12 White, Green L1 (NCS S 0300-N, NCS S 4005-G80Y)

5924-73 /12 White, Grey L1 (NCS S 0300-N, NCS S 1000-N)


LED IP20  0-10V Multi-volt

Sticks



Design by Arik Levy.

Lighting Toolkit



Wall-Wall / Ceiling-Ceiling

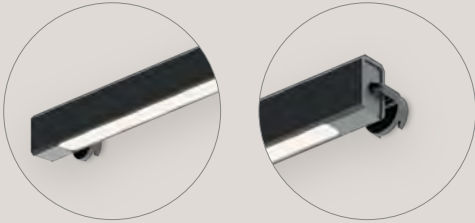



Wall-Wall (corner) / Wall-Ceiling

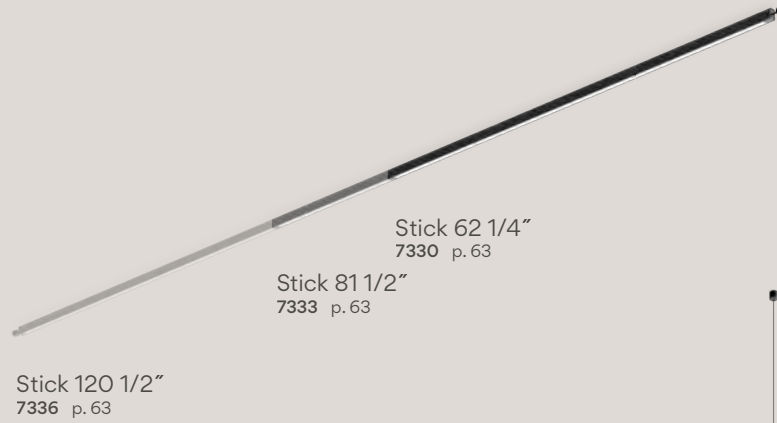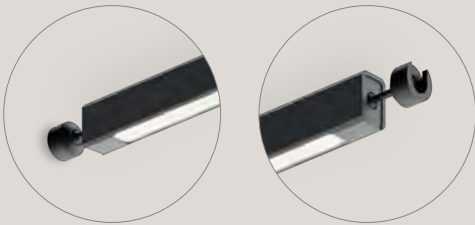

Wall-Pendant

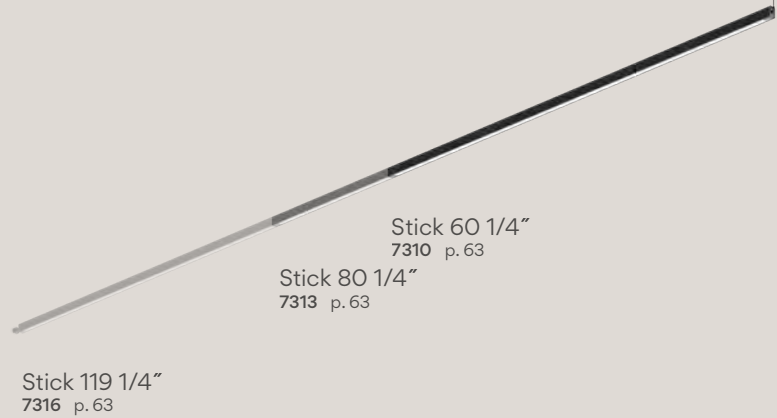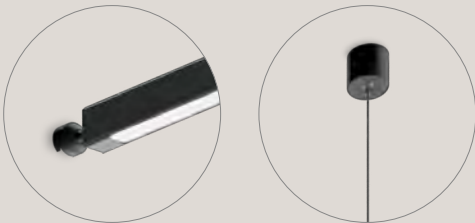

Pendant-Pendant

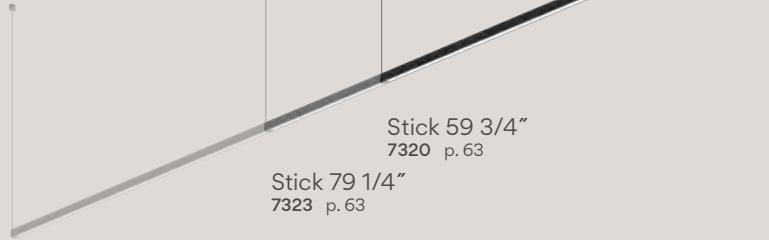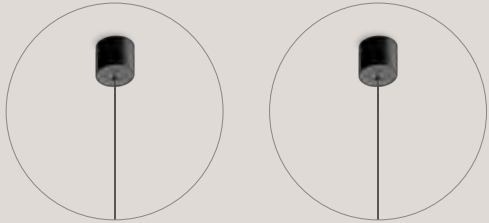


Stick 118"
7326 p. 63


Stick 79 1/4"
7323 p. 63

Stick 59 3/4"
7320 p. 63

Pendant

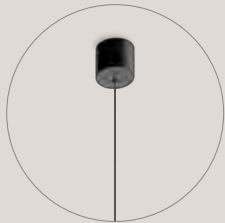

Floor-Wall

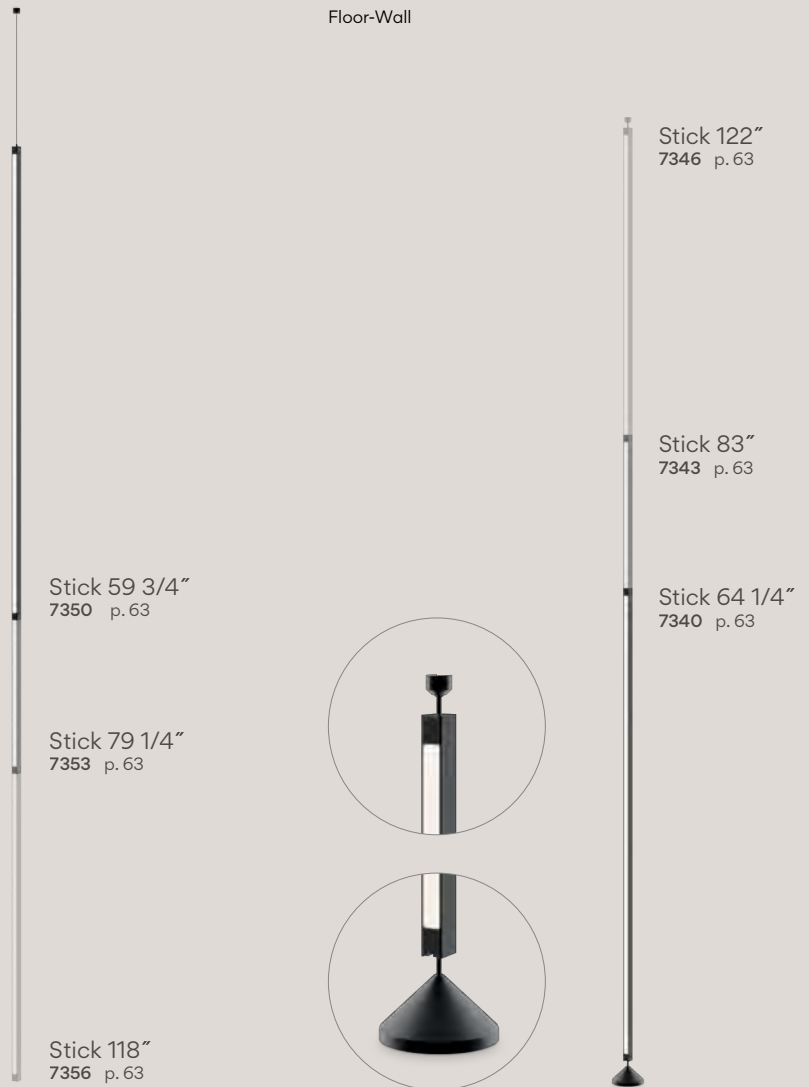

Stick 59 3/4"
7350 p. 63

Stick 79 1/4"
7353 p. 63

Stick 118"
7356 p. 63

Stick 122"
7346 p. 63

Stick 83"
7343 p. 63

Stick 64 1/4"
7340 p. 63

Wall-Wall / Ceiling-Ceiling
 Wall-Wall (corner) / Wall-Ceiling
 Wall-Pendant
 Ceiling-Pendant
 Pendant-Pendant
 Pendant

Sticks 59-inch (1.5m).

7300 7310 7320 7330 7350

1 x LED STRIP 26.4 W 24V.

/1 M 2700 K. CRI >90. 3260 lm. 123 lm/W.

/3 M 3500 K. CRI >90. 3535 lm. 134 lm/W.

Sticks 78-inch (2m).

7303 7313 7323 7333 7353

1 x LED STRIP 35.2 W 24V.

/1 M 2700 K. CRI >90. 4346 lm. 123 lm/W.

/3 M 3500 K. CRI >90. 4714 lm. 134 lm/W.

Sticks 118-inch (3m).

7306 7316 7326 7336 7356

1 x LED STRIP 52.8 W 24V.

/1 M 2700 K. CRI >90. 6519 lm. 123 lm/W.

/3 M 3500 K. CRI >90. 7071 lm. 134 lm/W.

Sticks: Aluminum.

Diffuser: Polycarbonate.

Driver and Dimming depends on selected installation accessory (see page 93).

Suspension cables up to 118-inch (3m).
 for (Wall - Pendant) and (Pendant - Pendant).

Personalization options available

- LED 3000 K.

- Extra cable length for (Wall - Pendant) and (Pendant - Pendant).

Request more information.

11 /1 M Black (NCS S 8500-N) ●

11 /3 M Black (NCS S 8500-N) ●

LED IP20  Dimmer

Floor-Wall

Sticks 59-inch (1.5m).

7340

1 x LED STRIP 26.4 W 24V.

/1 M 2700 K. CRI >90. 3260 lm. 123 lm/W.

/3 M 3500 K. CRI >90. 3535 lm. 134 lm/W.

Sticks 78-inch (2m).

7343

1 x LED STRIP 35.2 W 24V.

/1 M 2700 K. CRI >90. 4346 lm. 123 lm/W.

/3 M 3500 K. CRI >90. 4714 lm. 134 lm/W.

Sticks 118-inch (3m).

7346

1 x LED STRIP 52.8 W 24V.

/1 M 2700 K. CRI >90. 6519 lm. 123 lm/W.

/3 M 3500 K. CRI >90. 7071 lm. 134 lm/W.

Sticks: Aluminum.

Diffuser: Polycarbonate.

Driver and Dimming depends on selected installation accessory (see page 93).

Personalization options available

- LED 3000 K.

Request more information.

11 /1 M Black (NCS S 8500-N) ●

11 /3 M Black (NCS S 8500-N) ●

LED IP20  Dimmer

Installation types



Floor base & plug

 \varnothing 5" x 12 1/2"


Surface canopy

15 3/4" x 1 1/2" x 4"



Remote driver recessed micro canopy

 \varnothing 1 1/2" x 2 3/4"

Floor base & plug
 ACST000226

 Driver Constant Voltage 24V. 90~305V. 50/60Hz.
 Dimming: Push.

Body: Steel.

 
11 Black (NCS S 8500-N)


Surface canopy
 ACST000227 ACST000230

 Driver Constant Voltage 24V. 90~305V. 50/60Hz.
 Dimming: 1-10V.

Body: Steel.

11 Black (NCS S 8500-N)


Personalization options available

 - Dimming: DALI.
 Request more information.

Remote driver recessed micro canopy
 ACST000228 ACST000235

 Driver Constant Voltage 24V. 90~305V. 50/60Hz.
 Dimming: 1-10V.

Body: Aluminum.


11 Black (NCS S 8500-N)


Personalization options available

 - Dimming: DALI, TRIAC.
 Request more information.

Stand-alone

Floor

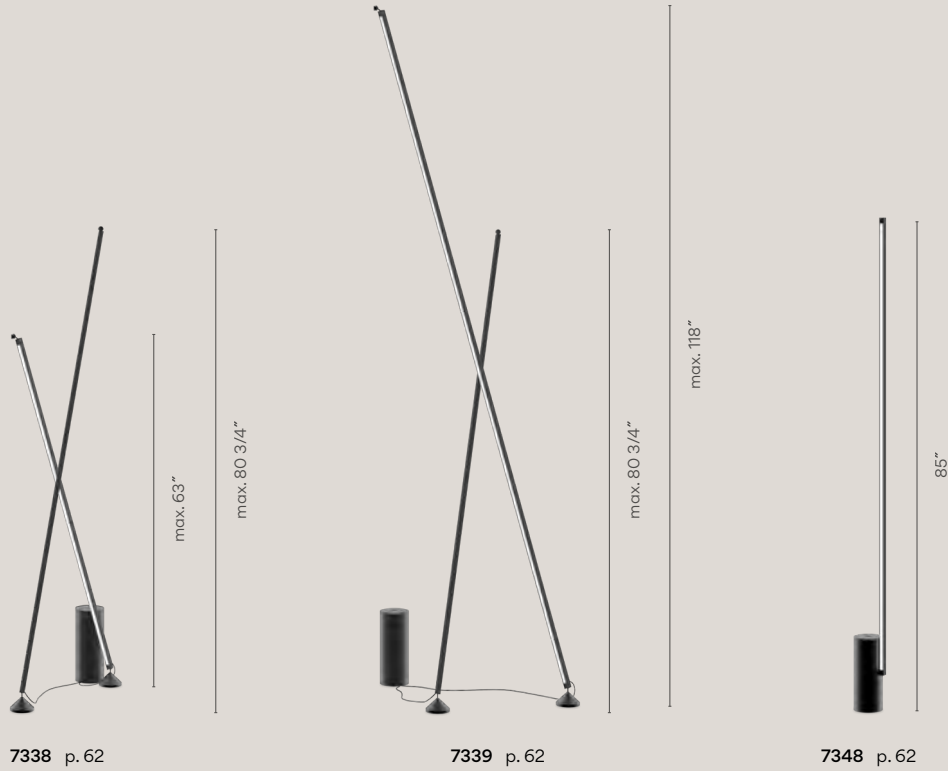

7338
 1 x LED STRIP 26.4 W 24V.
 1 x LED STRIP 35.2 W 24V.
 /15 2700 K. CRI >90. 7606 lm. 123 lm/W.
 /35 3500 K. CRI >90. 8249 lm. 134 lm/W.
 Driver Constant Voltage 24V. 90~305V. 50/60Hz
 Dimming: Push.

Personalization options available
 - LED 3000 K.
 Request more information.

Sticks: Aluminum.
 Diffuser: Polycarbonate.

7338-11/15 Black (NCS S 8500-N) ●
7338-11/35 Black (NCS S 8500-N) ●

LED IP20 PUSH

7339
 1 x LED STRIP 35.2 W 24V.
 1 x LED STRIP 52.8 W 24V.
 /15 2700 K. CRI >90. 10865 lm. 123 lm/W.
 /35 3500 K. CRI >90. 11785 lm. 134 lm/W.
 Driver Constant Voltage 24V. 90~305V. 50/60Hz
 Dimming: Push.

Personalization options available
 - LED 3000 K.
 Request more information.

Sticks: Aluminum.
 Diffuser: Polycarbonate.

7339-11/15 Black (NCS S 8500-N) ●
7339-11/35 Black (NCS S 8500-N) ●

LED IP20 PUSH

7348
 1 x LED STRIP 35.2 W 24V.
 /15 2700 K. CRI >90. 4346 lm. 123 lm/W.
 /35 3500 K. CRI >90. 4714 lm. 134 lm/W.
 Driver Constant Voltage 24V. 90~305V. 50/60Hz
 Dimming: Push.

Personalization options available
 - LED 3000 K.
 Request more information.

Sticks: Aluminum.
 Diffuser: Polycarbonate.


7348-11/15 Black (NCS S 8500-N) ●
7348-11/35 Black (NCS S 8500-N) ●

LED IP20 PUSH

Top

Design by Ramos & Bassols.

Ceiling Wall

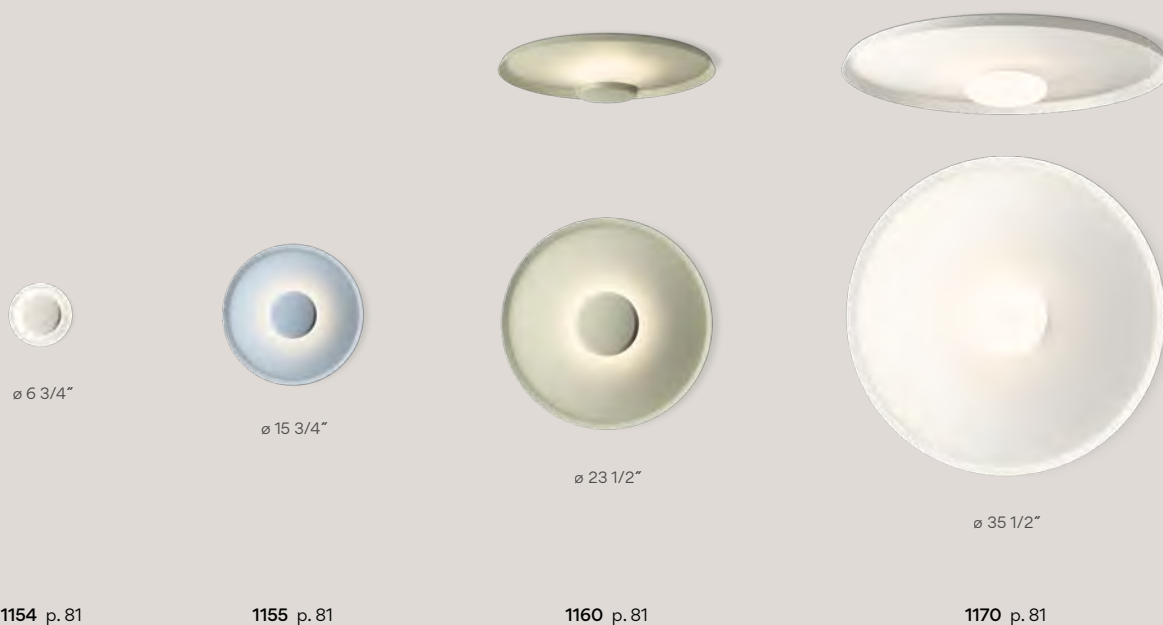

1154

1 x LED PLATE 5.5W 150mA.
LED 2700 K. CRI >90. 550 lm. 100 lm/W.
Driver Constant Current 150 mA. 100~240V. 50/60Hz

Personalization options available

- LED 3000K, 3500K.
- Remote Driver Dimming: 1-10V, DALI, LUTRON ECO
Request more information.

Body: Aluminum.

1154-10 /10 White (NCS S 0300-N)

1154-36 /10 Soft pink (NCS S 1010-Y50R)

1154-40 /10 Blue L1 (NCS S 3010-B)

1154-47 /10 Green L1 (NCS S 4005-G80Y)

LED IP20 120V ADA

1155

1 x LED PLATE 18.3W 500mA.
LED 2700 K. CRI >90. 2050 lm. 112 lm/W.
Driver Constant Current 500 mA. 110~127V. 50/60Hz.
Dimming: DALI, 1-10V, Push.

Personalization options available

- LED 3000K, 3500K.
- Dimming: TRIAC, LUTRON ECO
Request more information.

Body: Aluminum.

1155-10 /1A White (NCS S 0300-N)

1155-36 /1A Soft pink (NCS S 1010-Y50R)

1155-40 /1A Blue L1 (NCS S 3010-B)

1155-47 /1A Green L1 (NCS S 4005-G80Y)

LED IP20 Dimmer 120V ADA

1160

1 x LED PLATE 26.4W 700mA.
LED 2700 K. CRI >90. 2880 lm. 109.10 lm/W.
Driver Constant Current 700 mA. 110~127V. 50/60Hz.
Dimming: DALI, 1-10V, Push.

Personalization options available

- LED 3000K, 3500K.
- Dimming: TRIAC, LUTRON ECO
Request more information.

Body: Aluminum.

1160-10 /1A White (NCS S 0300-N)

1160-36 /1A Soft pink (NCS S 1010-Y50R)

1160-40 /1A Blue L1 (NCS S 3010-B)

1160-47 /1A Green L1 (NCS S 4005-G80Y)

LED IP20 Dimmer 120V ADA

1170

3 x LED 13.4W 700mA.
LED 2700 K. CRI >90. 3300 lm. 82.08 lm/W.
Driver Constant Current 700 mA. 110~127V. 50/60Hz.
Dimming: DALI, 1-10V, Push.

Personalization options available

- LED 3000K, 3500K.
Request more information.

Body: Aluminum.
Diffuser: Triplex Opal Glass.

1170-10 /1A White (NCS S 0300-N)

1170-36 /1A Soft pink (NCS S 1010-Y50R)

1170-40 /1A Blue L1 (NCS S 3010-B)


1170-47 /1A Green L1 (NCS S 4005-G80Y)

LED IP20 Dimmer 120V


Brisa

Design by Lievore, Altherr, Molina.

Outdoor

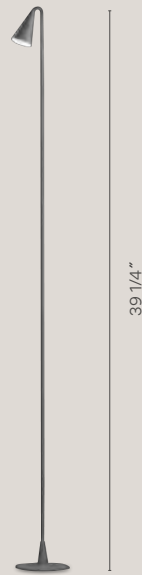

4630 p. 84

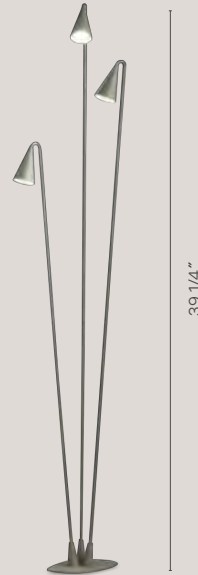

4635 p. 84

4630
 1 x LED 2.1W 700mA.
 LED 2700 K. CRI >90. 199 lm. 95 lm/W.
 Driver Constant Current 700mA. 100-240V. 50/60Hz.

Built-in.

Personalization options available

- LED 3000K, 3500K.
- Remote driver dimming: DALI, LUTRON ECO
- Min. quantity, upcharge and extra lead time apply.

Shade and Base: Aluminum.
 Disc: Stainless steel.
 Vertical tube: Steel.

4630-07 /10 Khaki (RAL 7039)

4630-54 /10 Oxide (RAL 8014)

LED IP65 cULus 120V

4635
 3 x LED 2.1W 700mA.
 LED 2700 K. CRI >90. 598 lm. 95 lm/W.
 Driver Constant Current 700mA. 100-240V. 50/60Hz.

Built-in.

Personalization options available

- LED 3000K, 3500K.
- Remote driver dimming: DALI, LUTRON ECO
- Min. quantity, upcharge and extra lead time apply.

Shade and Base: Aluminum.
 Disc: Stainless steel.
 Vertical tube: Steel.

4635-07 /10 Khaki (RAL 7039)

4635-54 /10 Oxide (RAL 8014)

LED IP65 cULus 120V

ACKNOWLEDGEMENTS

Project name: DTI Group - Office
Architecture & Interior Design: VEVS Amsterdam
(Rob van Sprang - Martijn d'Herripon)
Photography: Mike Bink
(page 10, 11)

© Pawel Chu
(page 17)

Marià Castelló
@mcastello_arch
(page 39, 73, 78)

© Fran Silvestre Arquitectos
(page 41)

Photography: Toshiyuki Yano
(page 47)

© Reinhart Julian
(page 44)

MR.P Studios
(page 43)

The content of this catalogue may be changed
or cancelled at the discretion of the VIBIA
management without prior notice.

VIBIA, INC.

USA & CANADA
272 Fernwood Ave.
Edison, NJ 08837. USA
Phone 732 417 1700.
Fax 732 417 1701.

sales@vibia.com
www.vibia.com/us/usa

HEADQUARTERS
Progrés 4-6.
08850 Gavà
(Barcelona - Spain)

