

Smart Building and Hybrid Work Solutions

Cisco Collaboration Centers

Milan Look Book

Version 17 (June 8, 2025) © 2025 Cisco and/or its affiliates. All rights reserved.





Milan Look Book

Designing the office for the Hybrid World

Located in the Porta Nuova business district, Cisco’s new Milan Collaboration Center is the epitome of style and innovation, in a city well-known for fashion and design. Like other newly renovated Cisco offices in New York, Atlanta, Paris, and Singapore, the Milan Collaboration Center combines hyper-connectivity, cutting-edge green tech, and beautiful, vibrant interiors to completely upend assumptions about what an in-office experience can be.

Encompassing 1,100m² and supporting 280 Milan-based employees, Cisco’s newest Milan office is the latest example of Cisco’s commitment to deliver connected, sustainable, and collaborative work environments. With over 70% of the available space dedicated to collaboration, learning, and socializing, the office is a hub for Cisco’s employees, customers, and partners to share information, make decisions, brainstorm, and build lasting relationships.

Built on a Power over Ethernet (PoE) foundation, 100% of the lighting and a majority of the shading and sit-stand desks are powered over low voltage from the Cisco network, contributing significantly to our sustainability and health and wellness goals. When combined with other technology elements – such as Cisco Collaboration Devices, Cisco Catalyst WiFi Access Points, Meraki Cameras and Sensors, and Cisco Smart Workspace– Cisco’s Milan Collaboration Center is the next step in Cisco’s journey to digitize its real estate portfolio.

The intent of this document is to highlight the details, components and partners used in the creation of this office. Any reference herein to any specific commercial products or service does not necessarily constitute or imply its endorsement or recommendation.

▶ Key Design & Implementation Partners	3
▶ Enabling Technology	4
▶ Floor Plan	12
▶ Hot Desk	13
▶ Video Booth	15
▶ Quiet Room (1 and 2 Person)	17
▶ Casual Huddle Room	20
▶ Brainstorming Huddle Room - Oval	23
▶ Small Collaboration Room	26
▶ Medium Collaboration Room - Dual Display	29
▶ Medium Collaboration Room - Video Centric	32
▶ Training Room	35
▶ Resources	38

Key Design & Implementation Partners



Owners Representative
& Project Management



Architectural
Design Services



Interiors & Furnishings



Collaboration Design
& Implementation Services



Smart Building Design
& Implementation Services

Enabling Technology

Smart Building Components



molex

Low Voltage 90W PoE lighting across entire floor and environmental sensors (air quality, temperature, humidity, and CO2) in the enclosed spaces



**Mecho
somfy
molex**

Intelligent automated shading platform



MT40 Smart Power Controllers and MT15 Environmental Sensors (air quality, temperature, humidity and CO2) in the open plan areas.

mht

Low Voltage 90W Power over Ethernet (PoE) powered actuators for height adjustable desks



Enabling Technology

Smart Cameras



High-definition Indoor Security Cameras

Providing local storage of video
and advanced object detection
to support people counting.



Cisco Meraki MV22 Cloud Managed Security Camera




Enabling Technology

Cisco Smart Workspaces



Workplace visualization tool, leveraging data sources across all technology platforms to help employees make better decisions within the work environment.

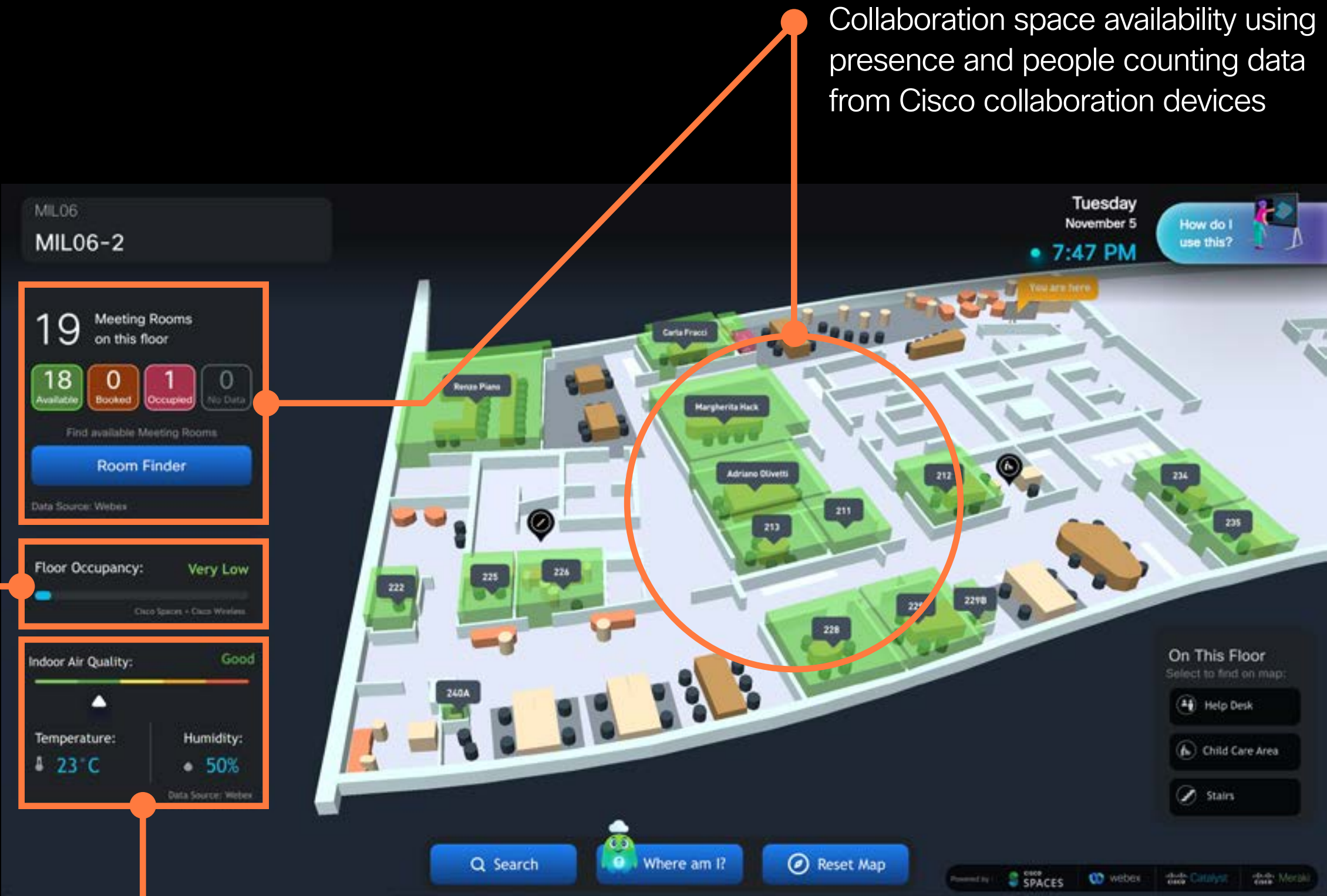

Floor occupancy from wireless access points

Indoor air quality from wired sensors in lighting platform, Cisco collaboration devices in collaboration spaces/individual spaces

Enabling Technology

Networking Elements



The Cisco Catalyst 90-watt UPOE+ 9300X stackable switching platform provides connectivity and power for both IT elements (wireless access points, collaboration devices, digital signage, smart cameras, etc.) and OT systems (lighting, shading and environmental sensors).



The Cisco Catalyst 9166 Wireless Access Points (APs) provide secure network connectivity for employees and guests. These devices have built in air quality (VoC) sensors, providing additional data on environmental performance.

Cisco Catalyst 9300X Switch



Cisco Catalyst 9166 Wireless Access Points



Enabling Technology

Cisco Video Devices



Cisco Room Bar

Integrated video conferencing system for small rooms



Cisco Room Bar Pro

Dual-camera integrated video conferencing system for medium rooms



Cisco Room Kit EQ

An AI-powered collaboration solution for large collaboration rooms and boardrooms



Cisco Room Kit Pro

A powerful and flexible room device bundle for very large rooms and custom AV integration scenarios.



Cisco Board Pro G2

Interactive collaboration board available in 55” and 75” screen sizes



Cisco Room Kit EQX

Powerful dual-screen collaboration system with integrated sound system



Cisco Desk Pro

Studio-quality desktop collaboration with a 27” screen, used in Quiet Rooms



Cisco Desk

All-in-one desktop collaboration device with a 24” screen, used on hot desks



Cisco Desk Mini

Desktop collaboration system with a 15” screen, used in video booth and banquettes



Cisco Ceiling Microphone Pro

Intelligent beam-forming mic, easy-to-deploy and gives great room coverage



Cisco Table Microphone Pro

Advanced beamforming table microphones.



Cisco Room Vision PTZ

Premium pan-tilt-zoom



Enabling Technology

Room Signage



Cisco Room Navigator for Wall



Bookable Rooms

Cisco Room Navigator for Wall – through its integration with the O365 Calendar – enables seamless room booking, calendar view, meeting information, and meeting extension with a few taps on the touch screen.



Available




Occupied

Adhoc Rooms

Using the presence and people counting capabilities of the Cisco Collaboration Devices, the Cisco Room Navigator changes the LED light and display based on occupancy - green for available and red for occupied.



Available

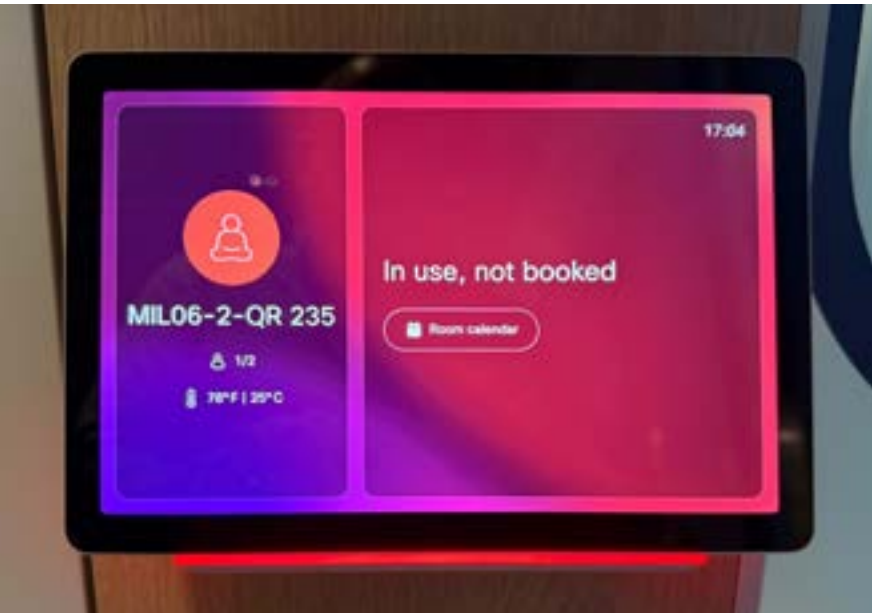

Occupied


Enabling Technology

Building System Integration



Leveraging the open APIs available from the smart building systems and the UI Extension feature within the Cisco collaboration devices, custom buttons have been installed on the Cisco Board Pros, Cisco Desk/Desk Pros, and the Cisco Room Navigator to control lights and shades in the collaboration spaces.

The integrations leverage the openness of the smart building APIs and the Cisco collaboration devices, and do not require using any third-party control systems (Crestron, AMX, etc.). They are now available on GitHub for download and use.

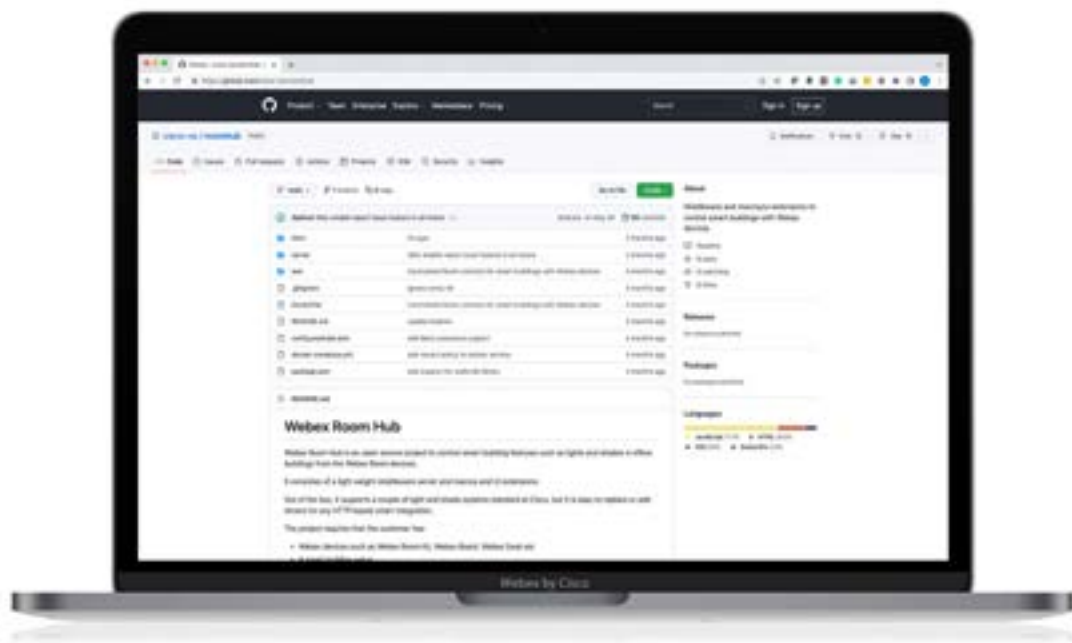



Enabling Technology

Digital Signage




Appspace Digital Signage on Samsung 65” display

Simultaneous display
of local office signage
within the Webex app,
via Appspace bot.

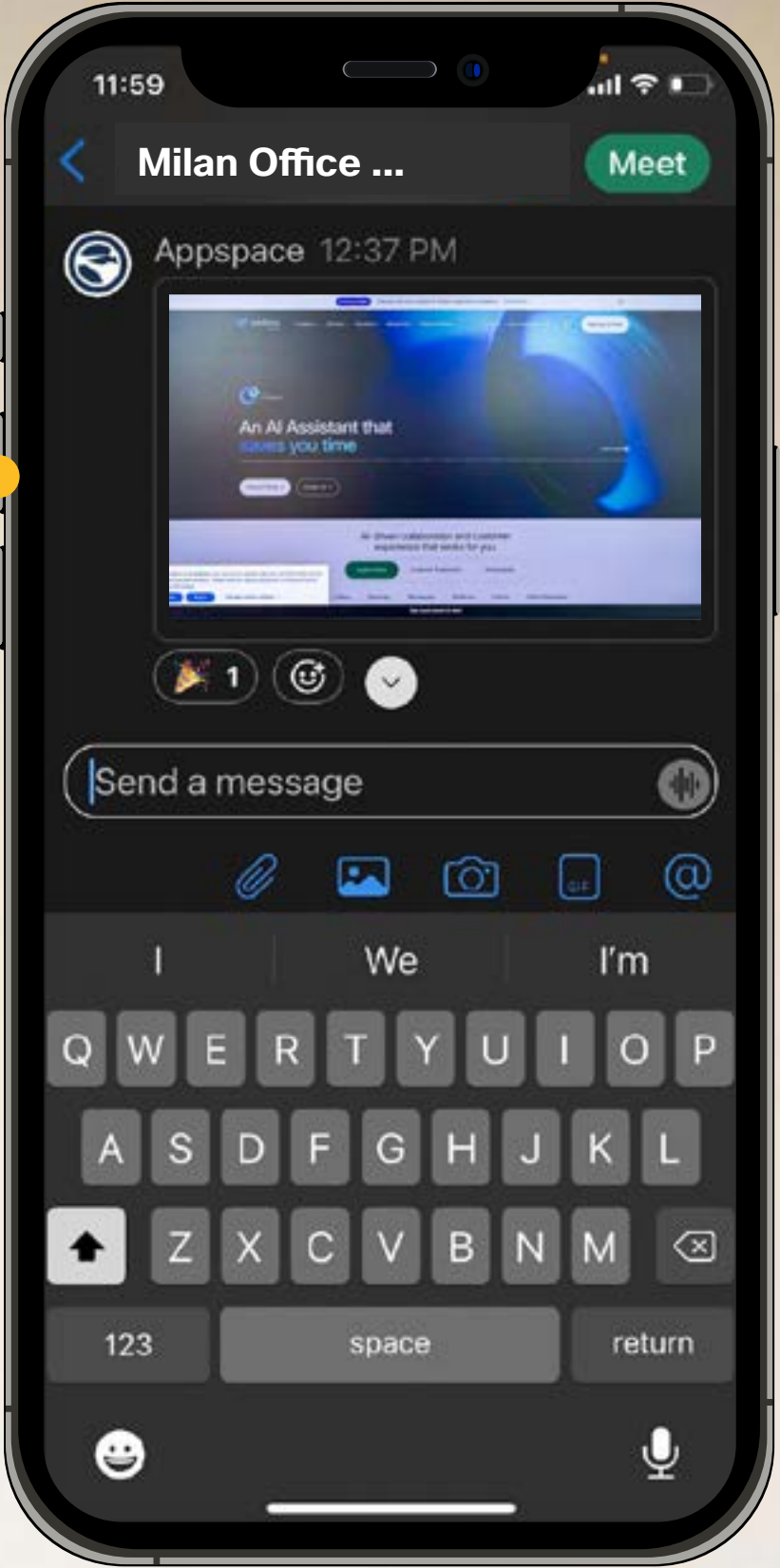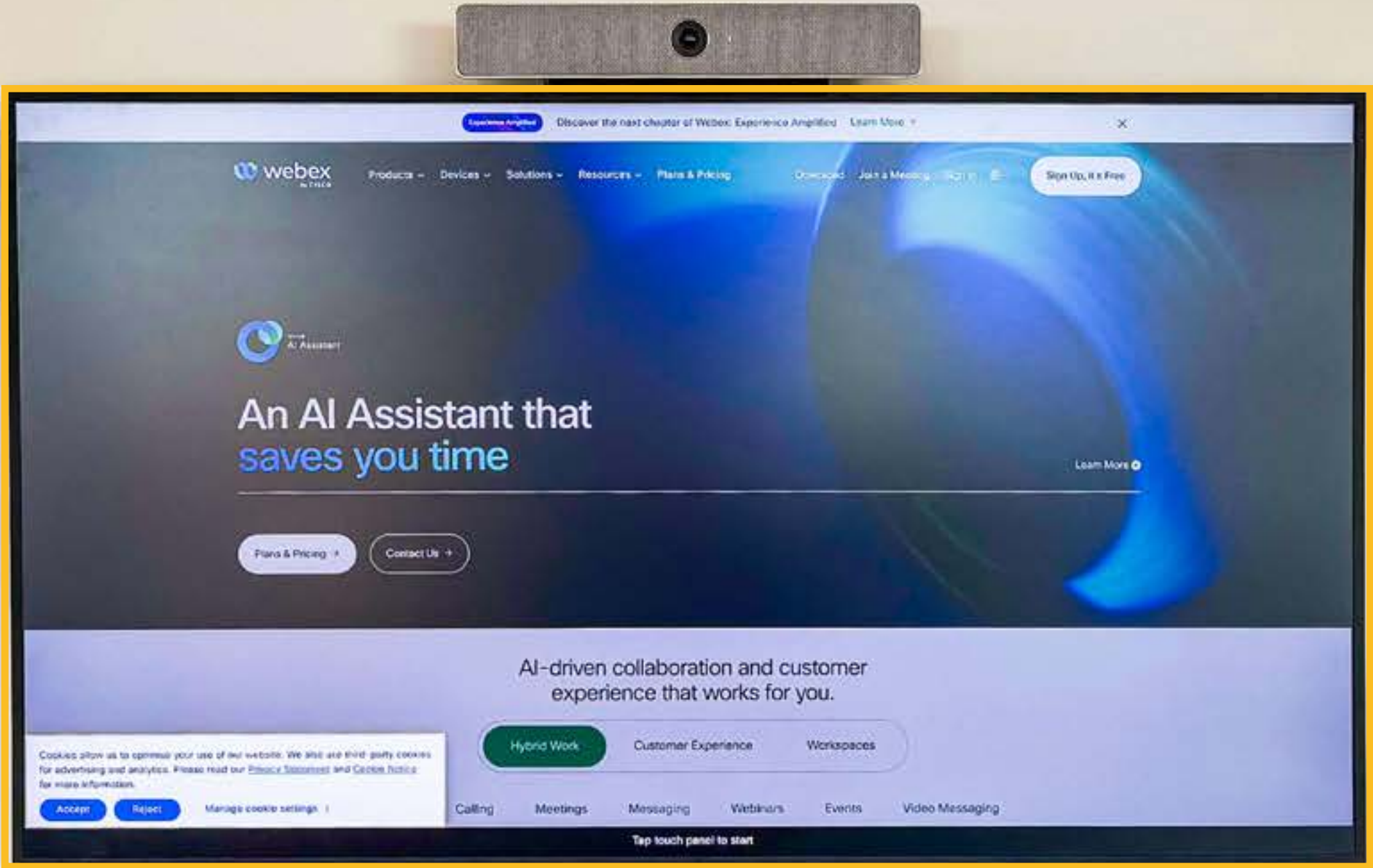



Floor Plan

 

Hot Desk

Overview




Providing areas for people to do focus work or passively participate in a remote meeting is critical in the hybrid work environment, and the hot desk is the ideal space for these activities.

In Milan, the Hot Desks in the public-facing area are 100% low voltage and powered by the Cisco network. This includes powering the height-adjustable desk motor, task light, USB-C power monument for laptop and mobile device charging, as well as the Cisco Desk device.

With a simple scan of the QR code, employees can sign in and book the desk for a few hours or for the rest of the day. Hot desking turns the Webex Desk into the employee's personal meeting device, enabling meeting notifications, One Button to Push, and whiteboarding. The device can also be used as a secondary display.

Features

- Cisco Desk
- Torasen Freeway Height-Adjustable Desk
- Flokk Profim Task chair
- Humanscale Nova Task Light
- MHTi Inspextor Node
- Linak Power Monument

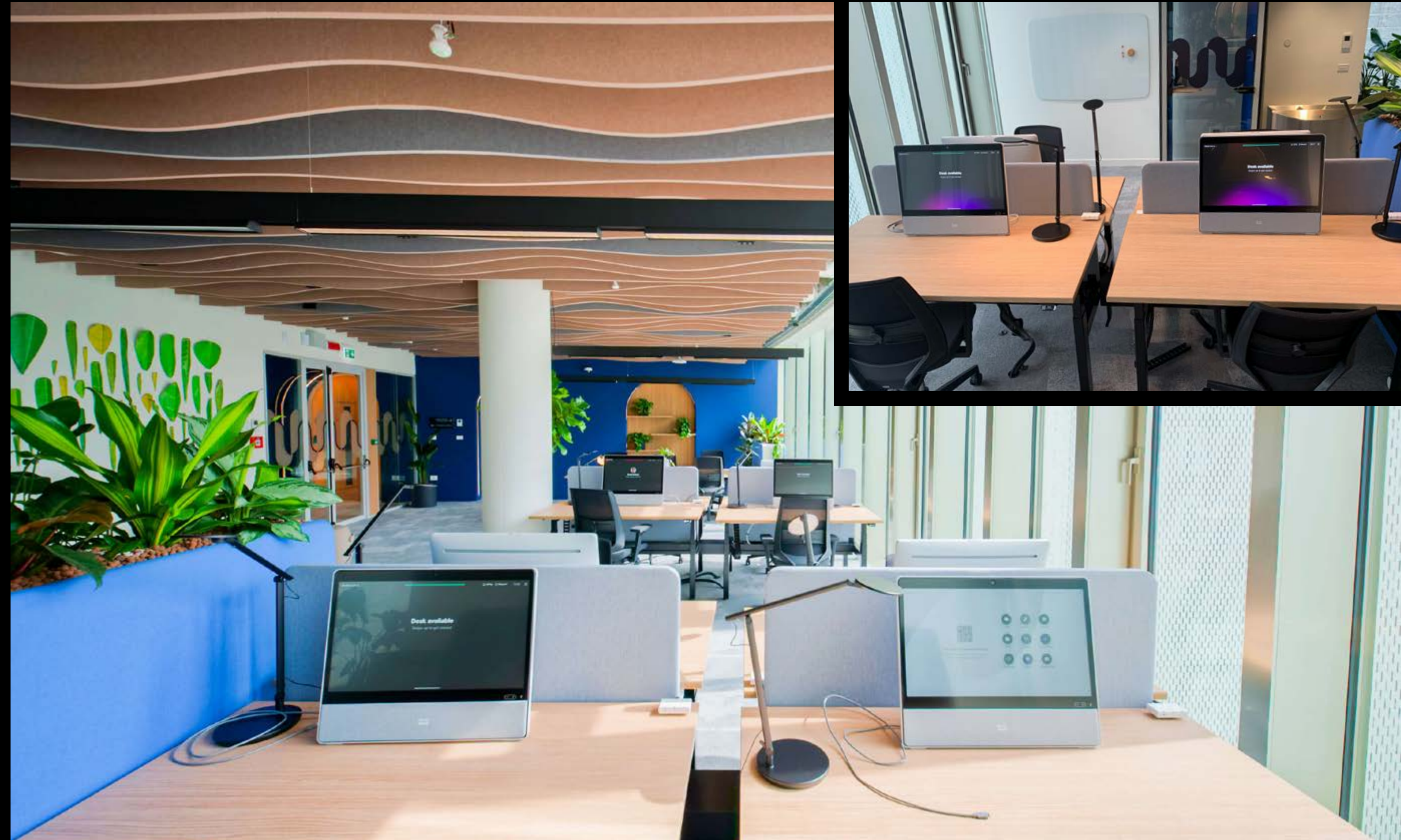


Hot Desk

Components



Flokk Profim Light Up 250SL Task Chair

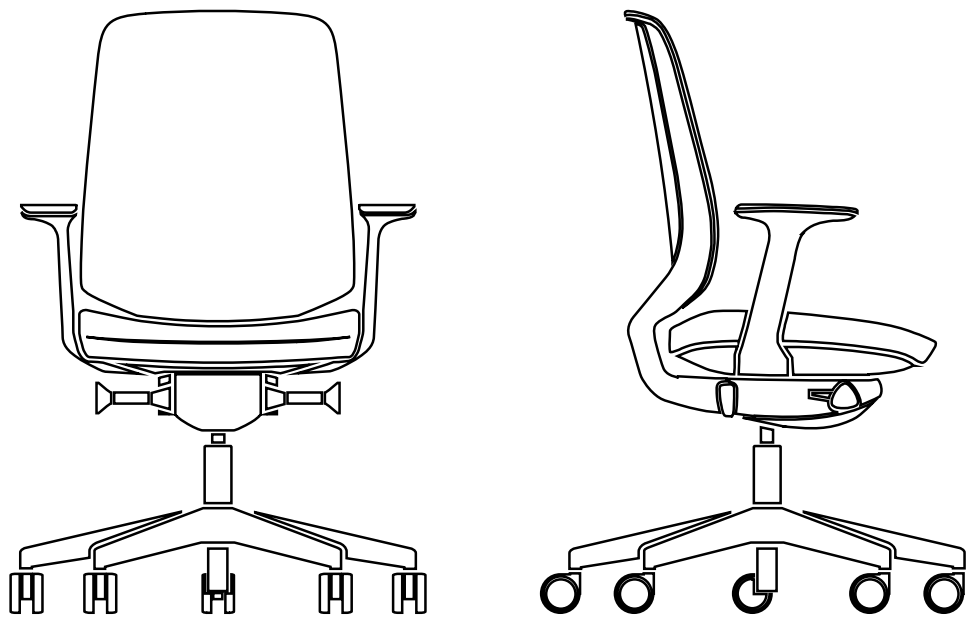

Task chair on 5 star base with castors

Seat Fabric:
Medley 60999

Backrest Finish:
Black Mesh

Armrests:
3D Arms

Base Finish:
Black



Cisco Desk



Torassen Freeway HA Desk



2 person sit-stand back to back workstation

Edge Detail:
Square

Frame:
Open Leg

Finish:
Vescom Acton 7062.24

Surface Dimensions:
1400mm (4'-7") x
700mm (2'-4")



Humanscale Nova Task Light



Finish: Black



MHT Inspextor



Linak Desktop Power Monument



Video Booth




Ideal for short-duration privacy from the open plan, these free-standing spaces are equipped with a Cisco Desk Mini to enable video, desktop sharing, and whiteboarding.

Cisco Desk Mini



Video Booth

Detail

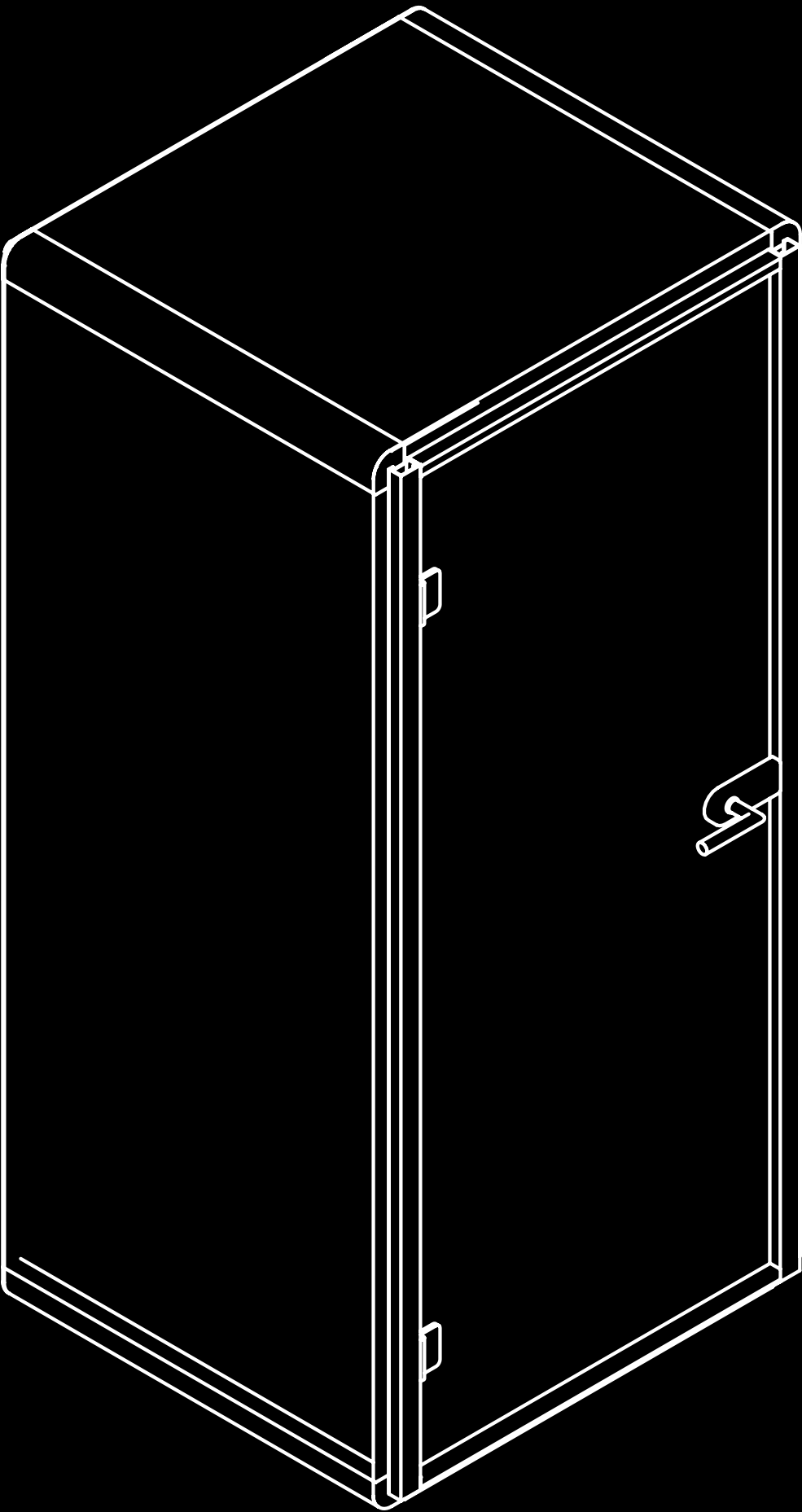


Senator Hideaway HWY01
Telephone Booth

Dimensions:

Overall Height: 2215mm (87.25")
Overall Width: 1026mm (40.5")
Overall Depth: 960mm (37.75")

10.8mm Acoustic Glass

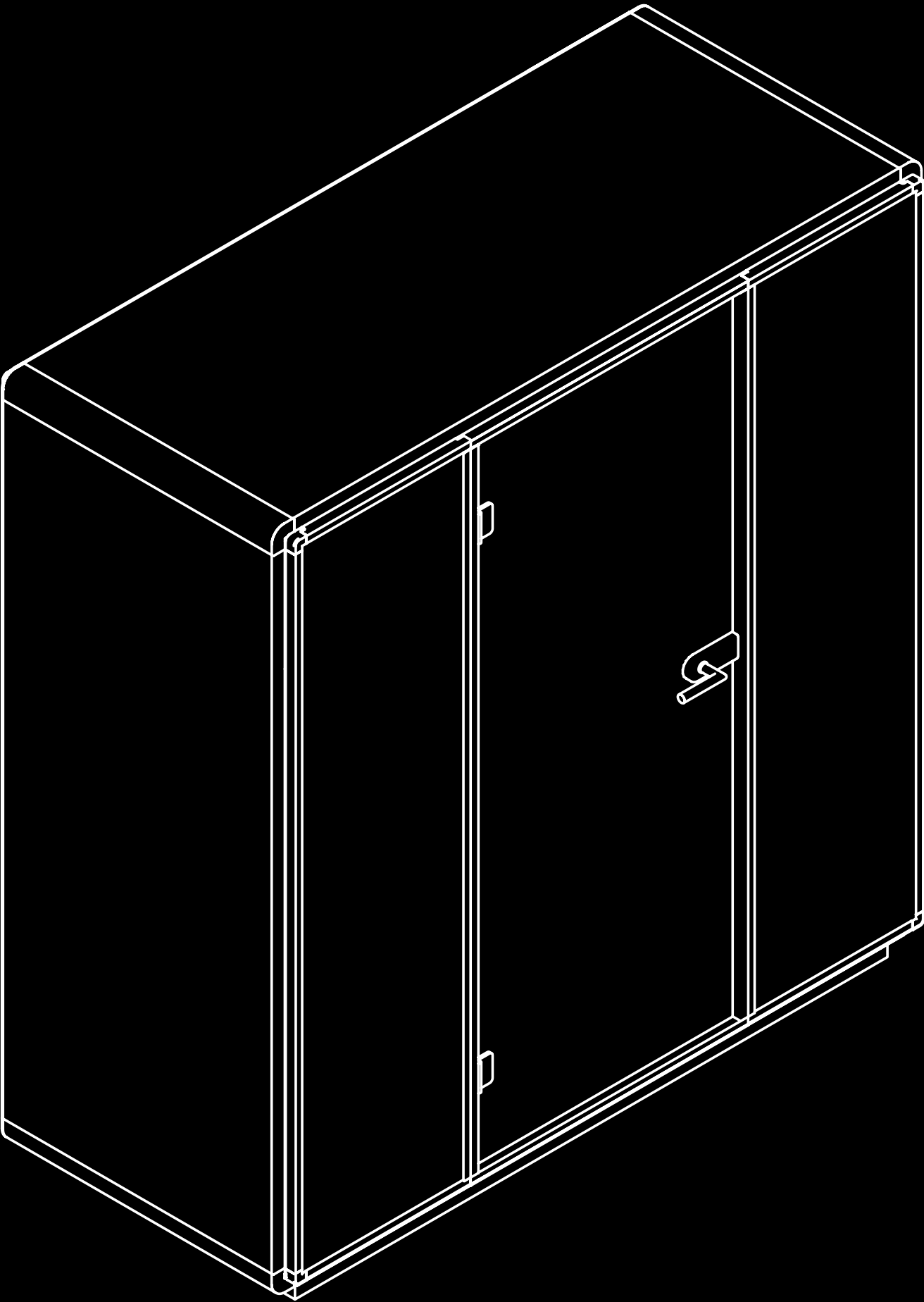

Senator Hideaway HWY02S
Two Person Booth with Seating

Dimensions:

Overall Height: 2290mm (90.25")
Overall Width: 2150mm (84.75")
Overall Depth: 960mm (37.75")

10.8mm Acoustic Glass

Quiet Room (1 and 2 Person)

Overview





1 Person

The one and two-person quiet rooms are the great space when employees and/or visitors need privacy to take a video call, carry out focused work, collaborate with another individual, or simply need a bit more screen space.

Features

- Cisco Desk (1 person) and Cisco Desk Pro (2 person)
- Flokk Profim Lightup 250SL Task Chair
- Humanscale Nova Task Light

2 Person

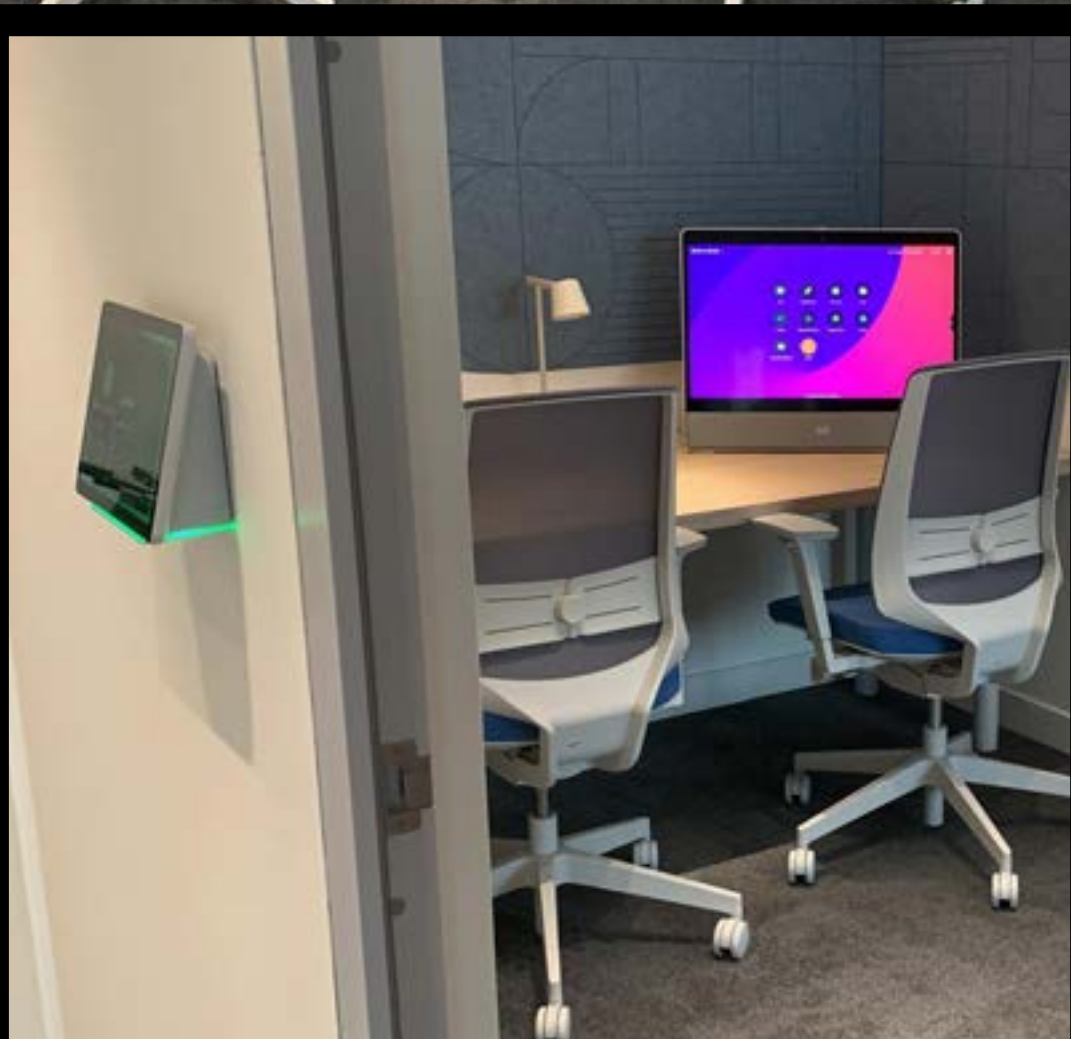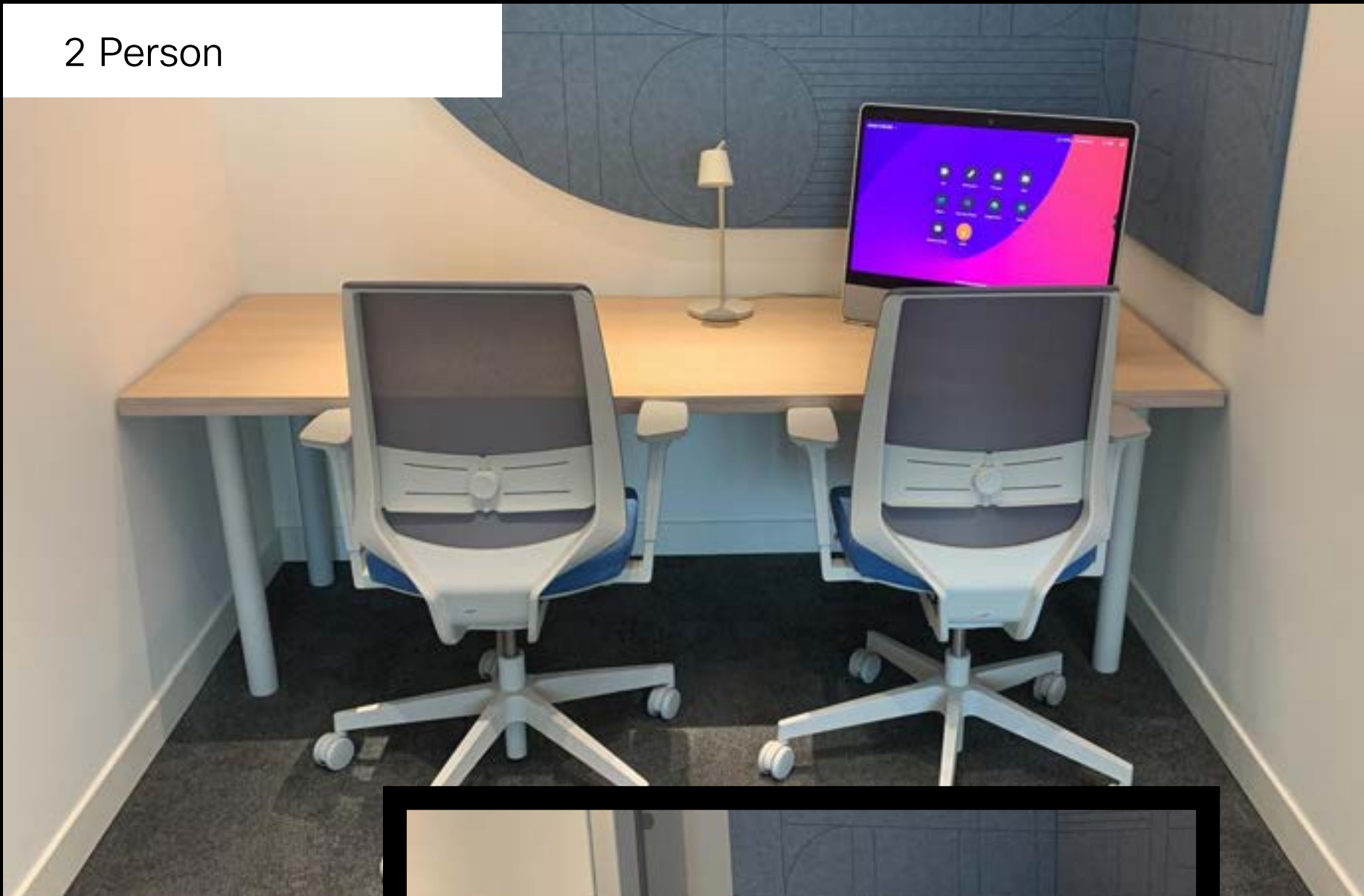


Quiet Room (1 and 2 Person)

Components



Flokk Profim Light Up 250SL Task Chair

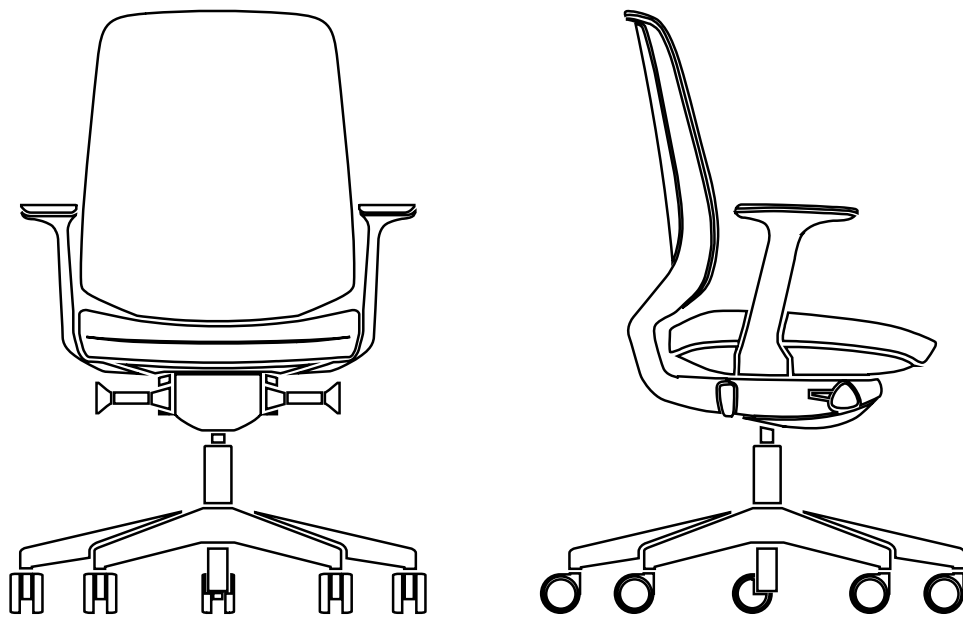

Task chair on 5 star base with castors

Seat Fabric:
Medley 66009 & Medley 67006

Backrest Finish:
Light Grey Mesh

Armrests:
3D Arms

Base Finish:
Light Grey

Flokk

Humanscale Nova Task Light



Finish: Black

Humanscale

Cisco Desk Pro



Cisco Desk




CISCO

Quiet Room (1 and 2 Person)


Room Layout



1 Person Quiet Room

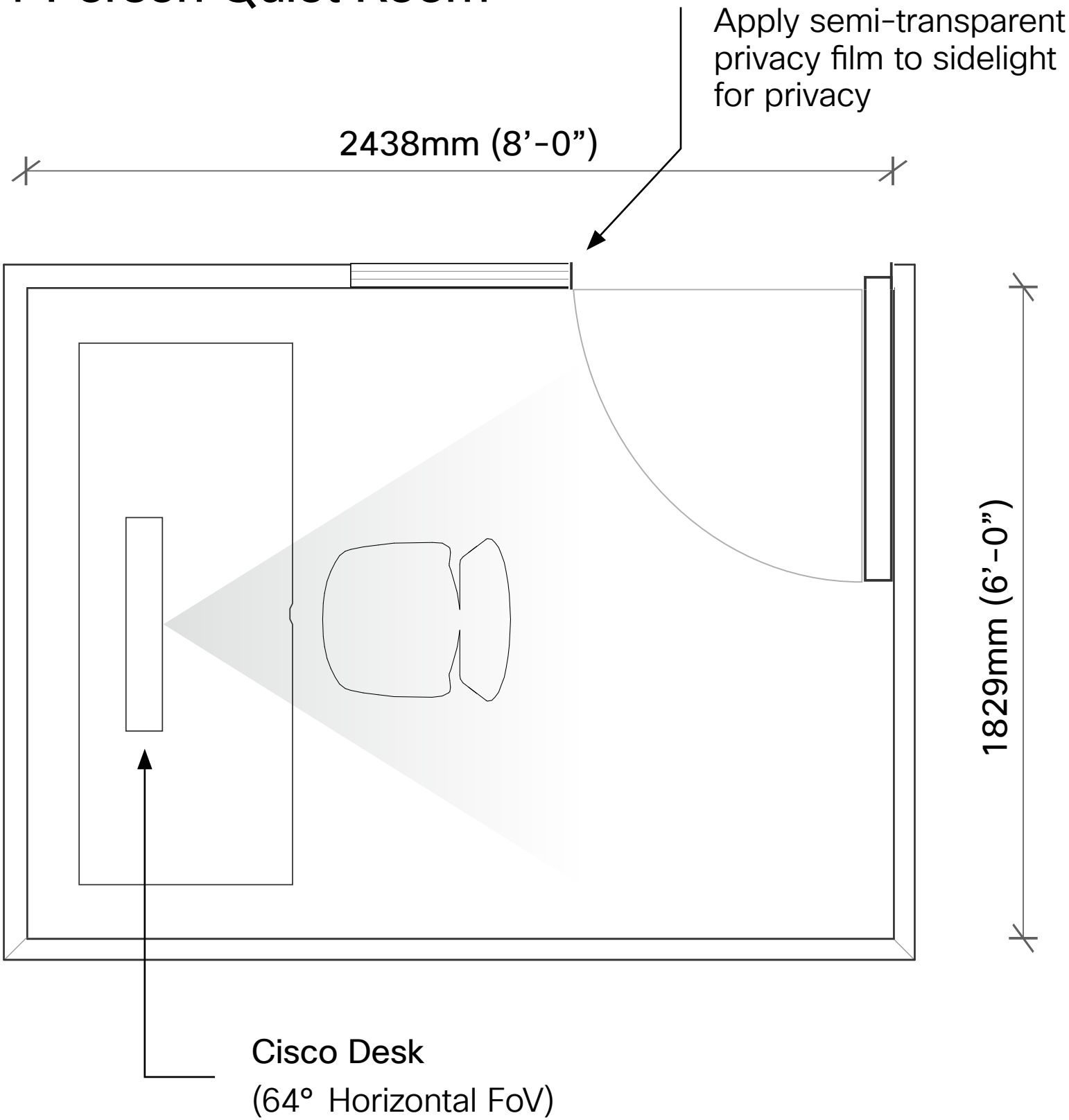

2 Person Quiet Room

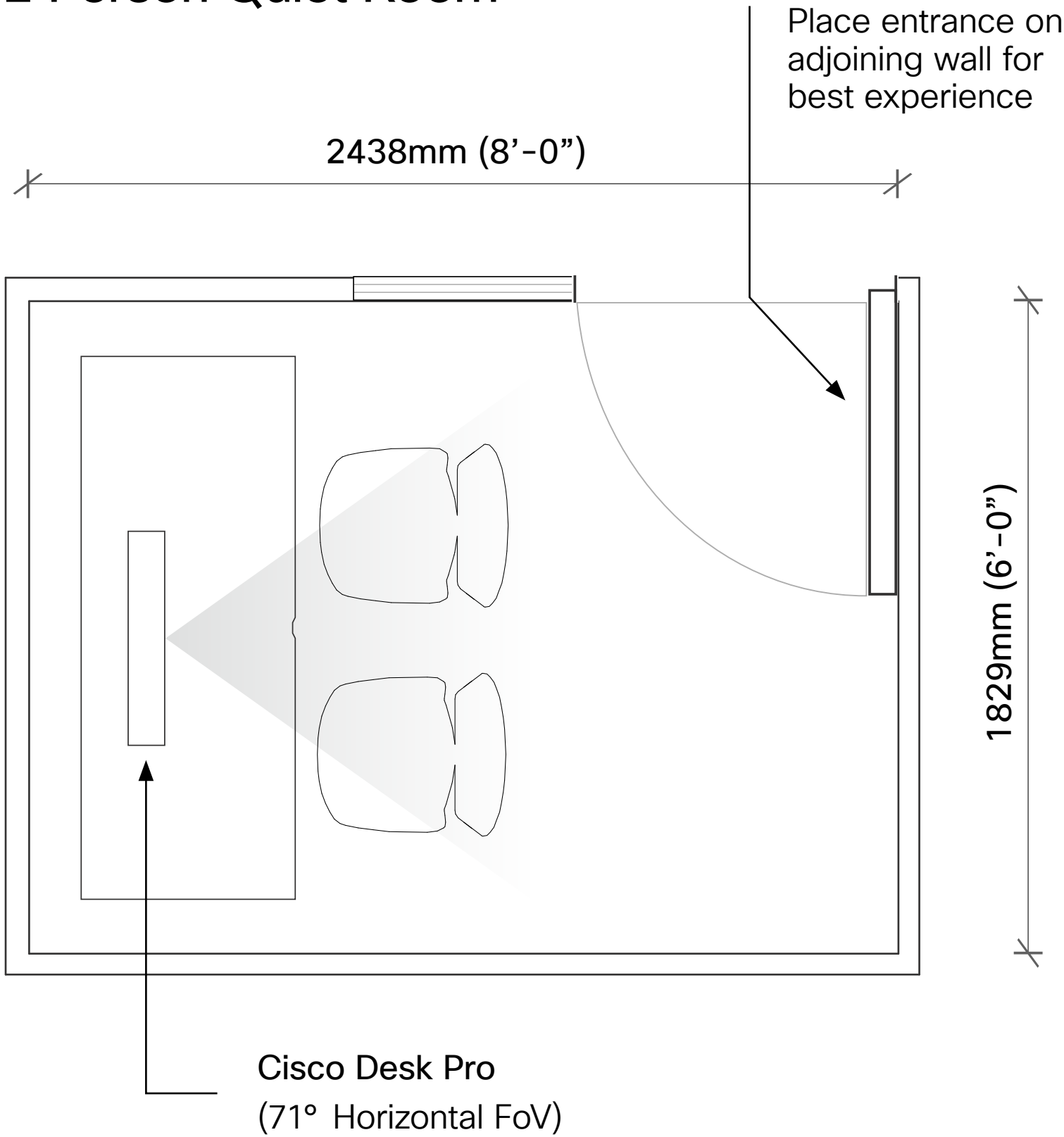

Note: Optimal size is nominal 2438mm x 1829mm (8'x6'), with a 1524mm (5') table, 1 person room can go to 2134mm x 1524mm (7'x5') with a 1291mm (4') table if needed

Casual Huddle Room

Overview




The Casual Huddle is specifically designed for that informal meeting with colleagues, even when some of those colleagues are remote.

The soft seat is lightweight and highly flexible, allowing the space to adapt to any and all needs. The Cisco Board Pro 55 is the perfect solution for this space, allowing employees to quickly join a meeting, white board or wirelessly share content both locally and in a call.

Features

- Cisco Board Pro 55 on a Floor Stand
- Sedus SELAB Sofa
- Allermuir Chair
- Sedus SEWORKS Side Table

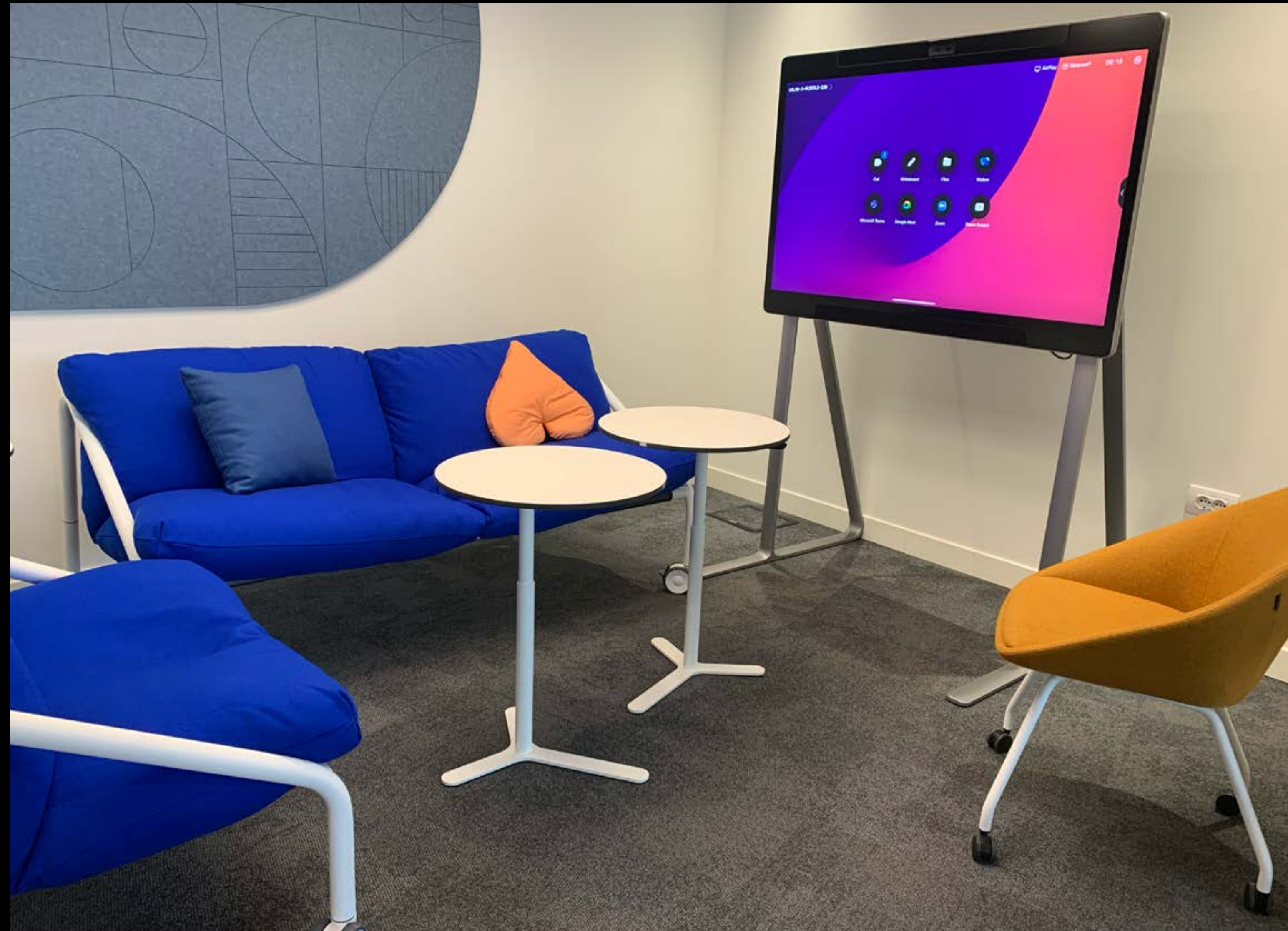

Casual Huddle Room

Components



Cisco Board Pro 55 with Floor Stand



CISCO

Sedus se:lab Sofa



Base: White
Upholstery: Gabriel Fame - 66075
1700mm W x 7250mm H x 980mm D

sedus

Sedus se:works
Table Assitant

Height adjustable side table
Base: White or Black
Finish: White or Black
500mm Dia x 470-1160mm H



sedus





Allermuir Famgilia
FM1101 Chair

Low back chair on a 4 leg frame and casters
Base: White
Finish: Camira Blazer Wesley CUZ82
640mm W x 825mm H x 595mm D

Allermuir

Casual Huddle Room

Room Layout

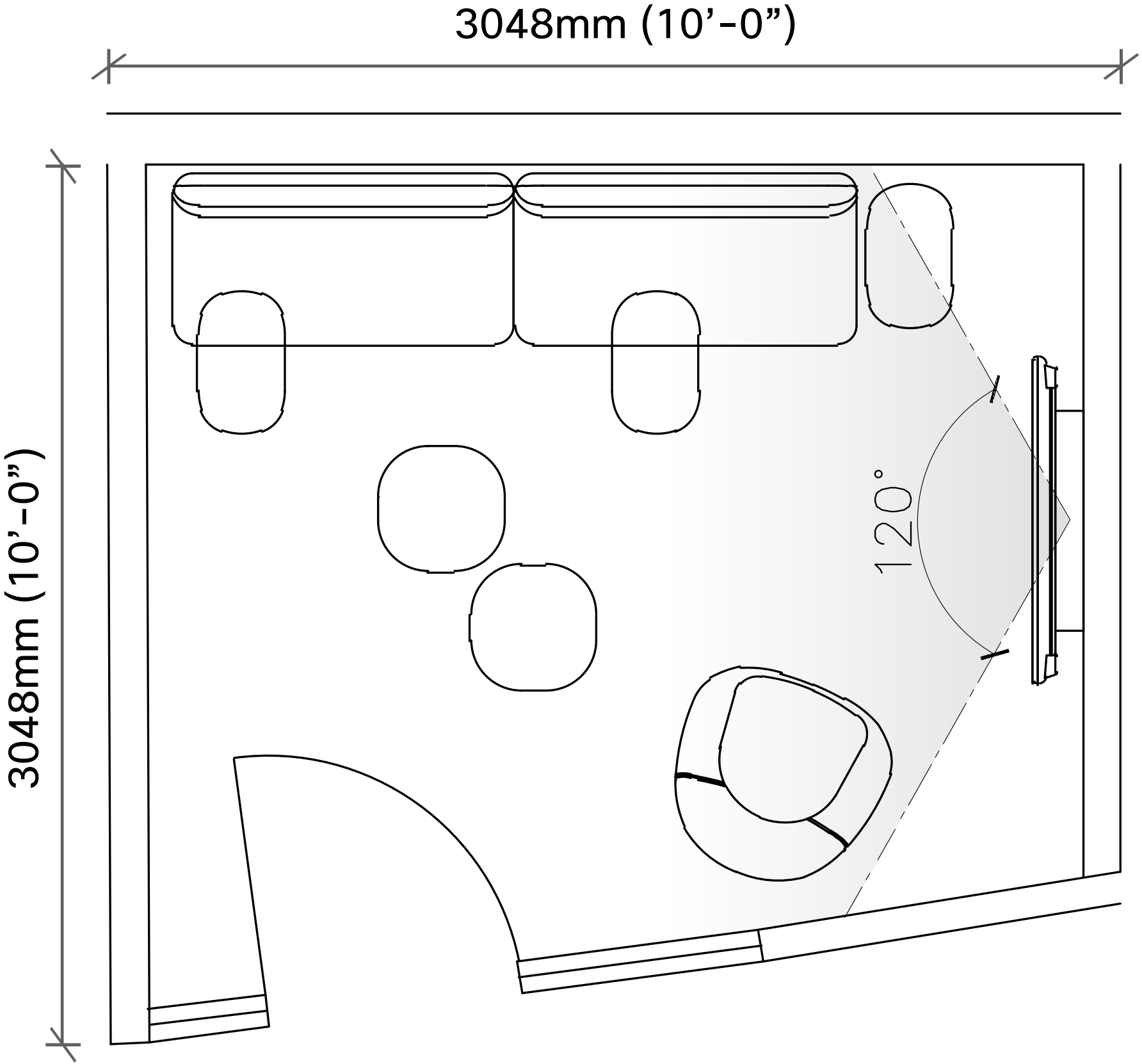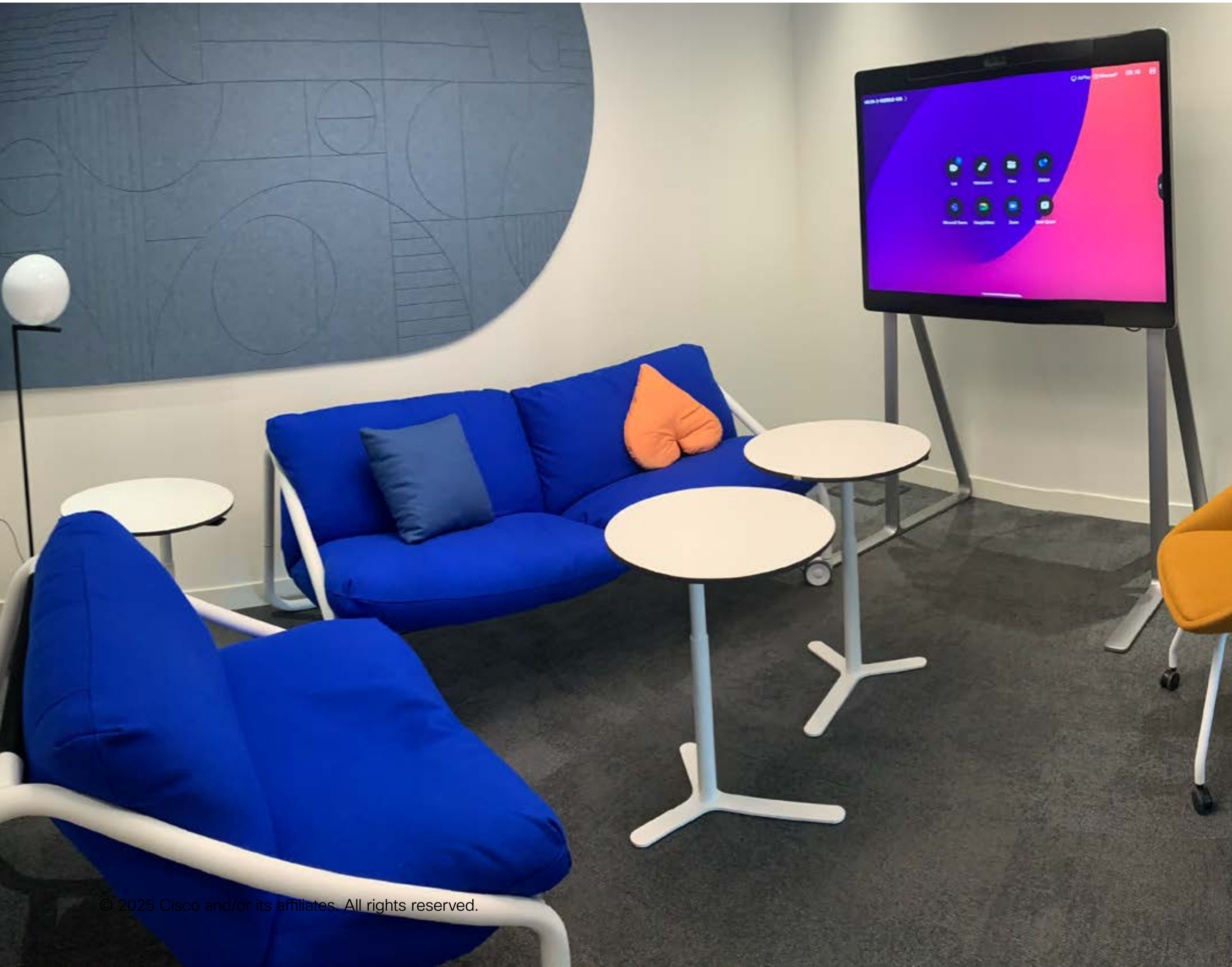

Note: Floor plan depicts suggested nominal size.

Brainstorming Huddle Room – Oval

Overview



Turn a small room into a space for big ideas. The Cisco Board Pro allows users to co-create, share content, or join a video call. The bar height table and chairs change the attendee's posture and encourage people to get up and interact with this all-in-one device.

Features

- Wall mounted Cisco Board Pro 55
- Bene Delta High Meeting Table
- Vitra Rookie High Stool



Brainstorming Huddle Room - Oval

Components



Vitra Rookie High Stool



Legs: Column with 5 star base and castors

Base: Soft Grey

Back Rest: Soft Grey

Seat Upholstery: Plano 13 - Black / Ice Blue

685mm W x 965-1260mm H x 685mm D

Bene Delta High Meeting Table



Oval high meeting with soft edge

Top Surface: Oak Vicenza Melamine (EZ)


Frame: Oak

1500mm W x 1069mm H x 900mm D

Cisco Board Pro 55




Cisco Board Pro Wall Mounting Kit

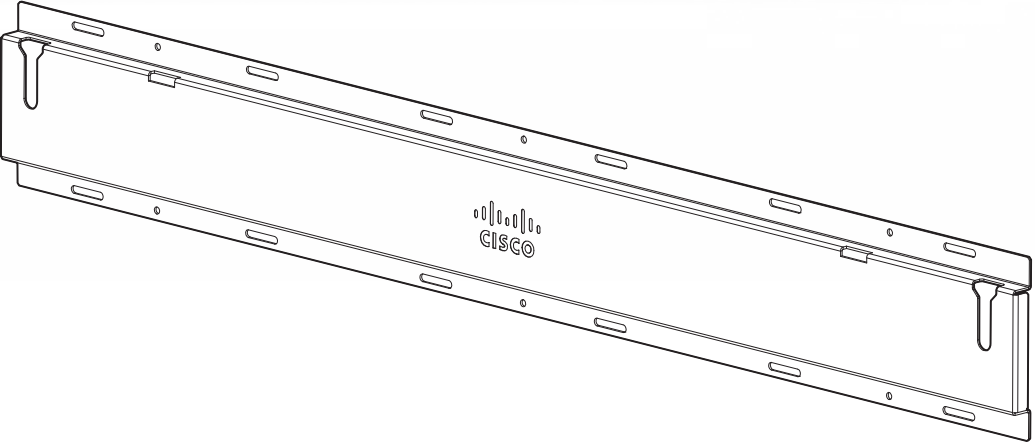

Brainstorming Huddle Room - Oval

Room Layout

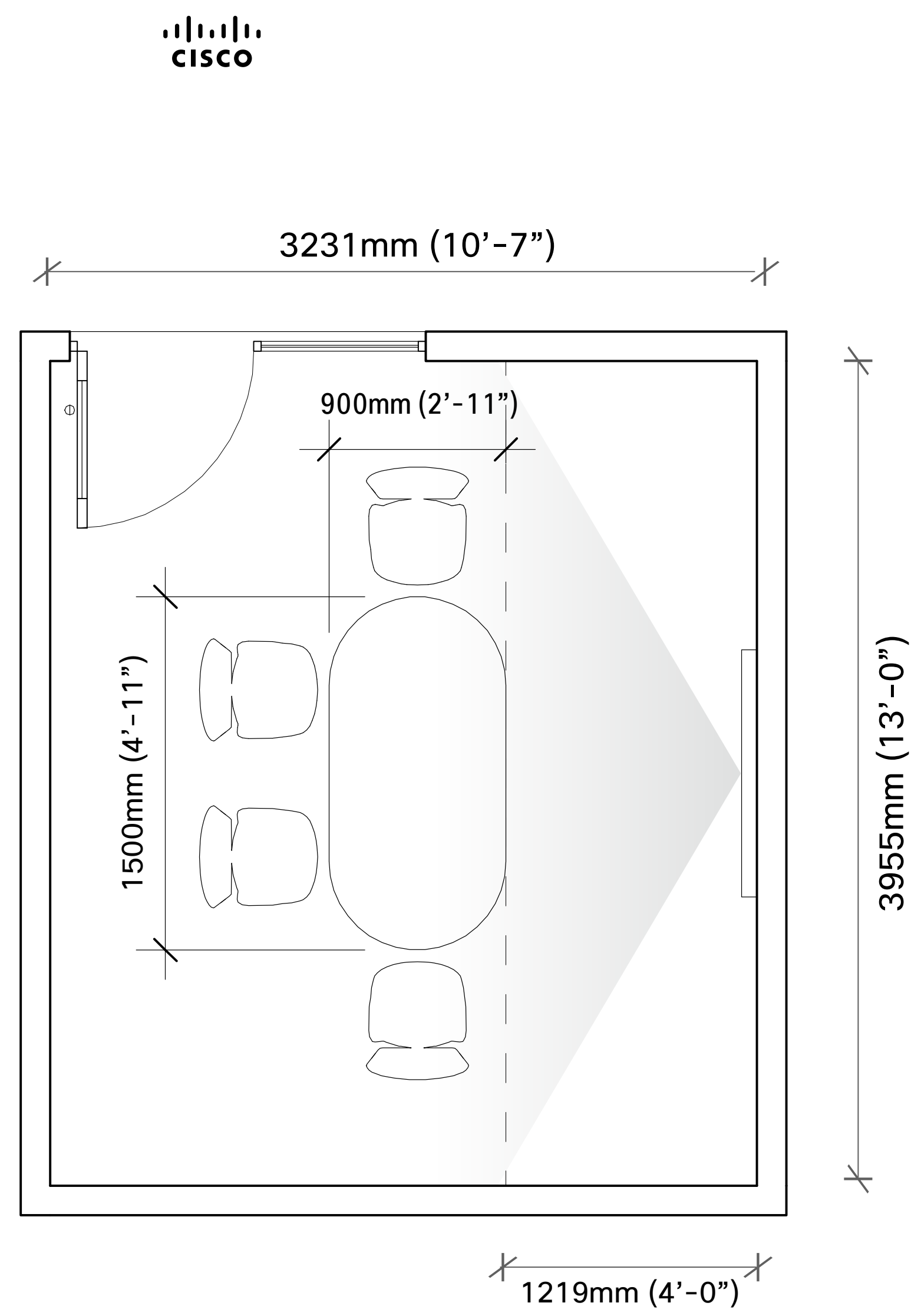

Note: Floor plan depicts suggested nominal size.

Small Collaboration Room

Overview



Small groups get work done. These small collaboration rooms are great spaces to bring in-person and remote colleagues together. The tapered surface of the table and 120° field of view of the Cisco Room Bar ensures everyone is in view.

Features

- Cisco Room Bar
- Single 55" Display (LG, Panasonic, Samsung, or Sony)
- Bene Delta Meeting Table
- Flokk Profim Lightup 250SL Task Chair




Small Collaboration Room

Components



Flokk Profim Light Up 250SL Task Chair

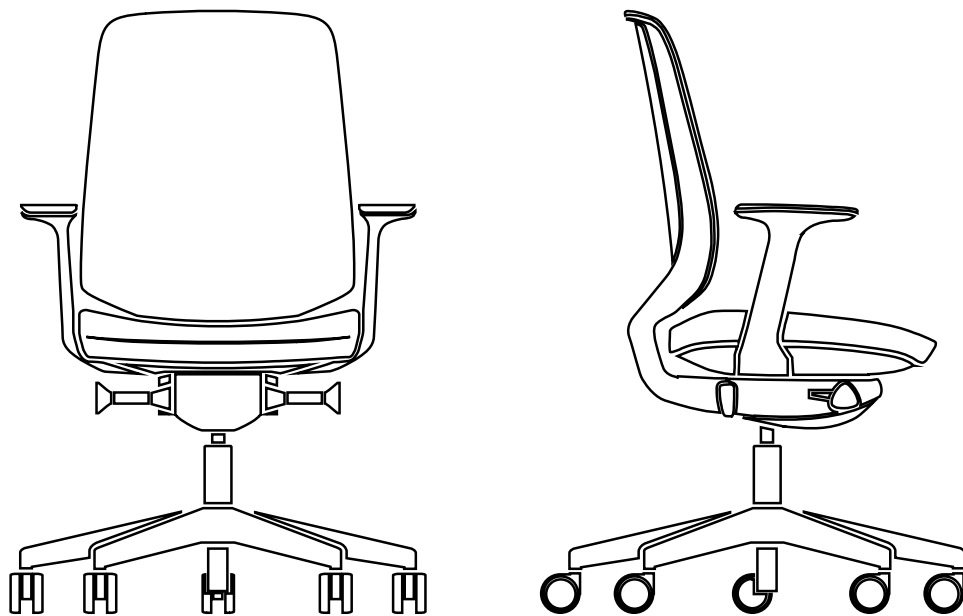

Task chair on 5 star base with castors

Seat Fabric:
Medley 66009 & Medley 67006

Backrest Finish:
Light Grey Mesh

Armrests:
3D Arms

Base Finish:
Light Grey




Cisco Room Bar



Single 55” display
(LG, Panasonic, Samsung, or Sony)



Bene Delta Pure Meeting Table

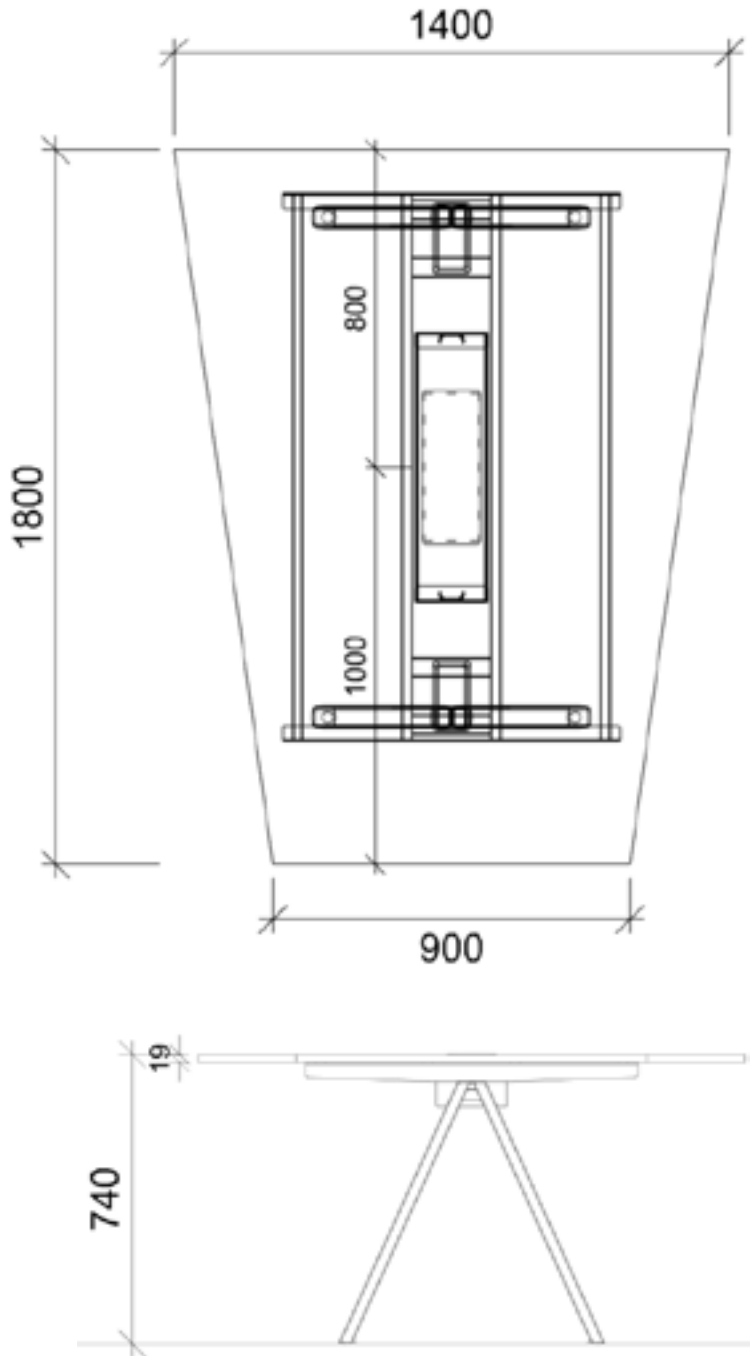

Trapezoidal table with workbench frame 4-leg rectangular pipe

Top Material: Chipboard 19mm

Top Colour: Oak Vicenza melamine (EZ)


Frame Colour: Oak

1800mm W x 740mm H x 1400mm D



Small Collaboration Room

Room Layout

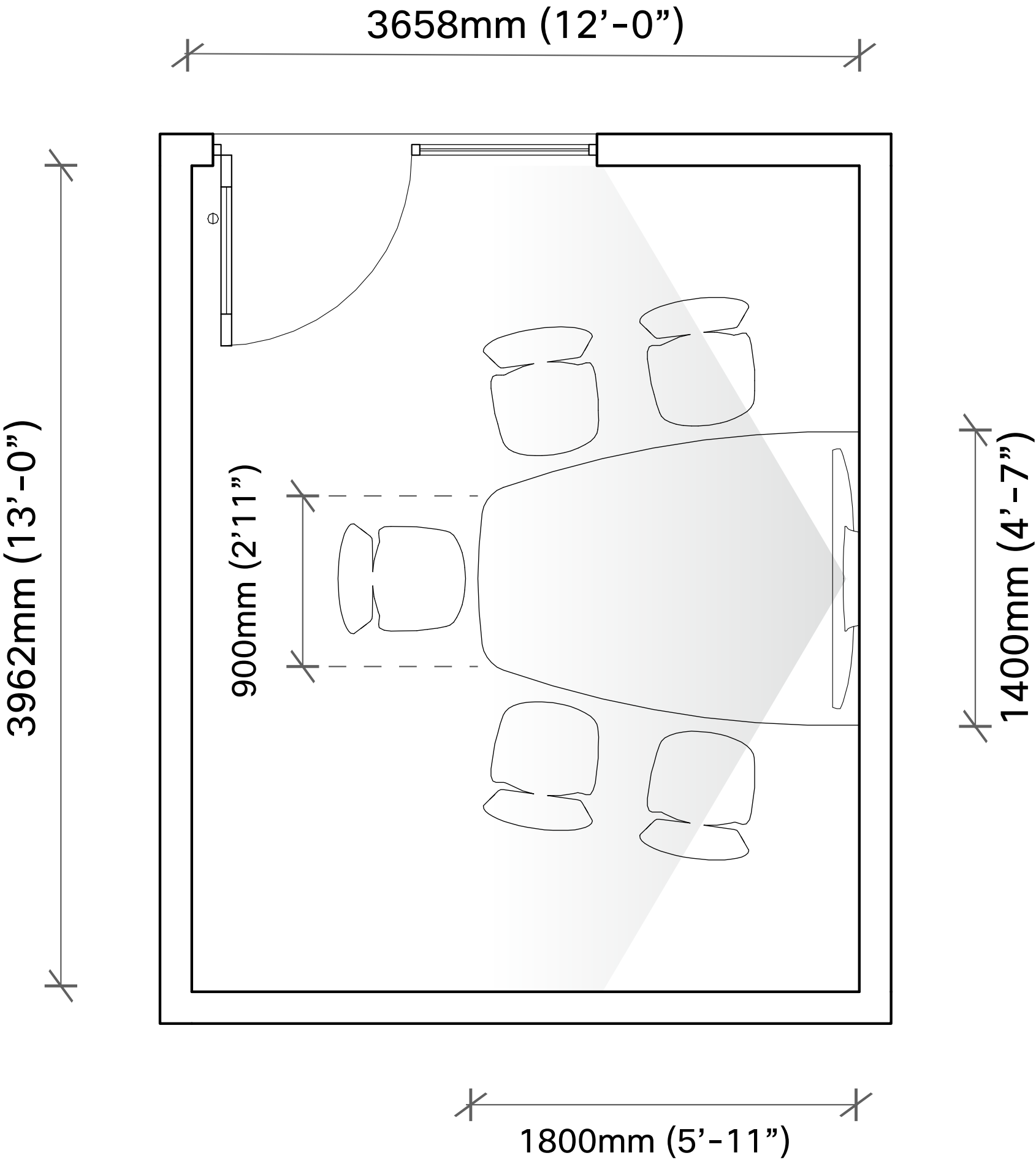

Note: Floor plan depicts suggested nominal size.

Medium Collaboration Room – Dual Display

Overview



PAGE
29 / 38

The perfect space to bring people together for knowledge sharing or decision making. The dual 75" displays allows in-room to see content and remote participants simultaneously, and the side mounted Cisco PTZ 4K cameras, in conjunction with the trapezoid shaped table ensures remote participants get the best view all the time.

Features

- Cisco Room Kit EQX on a Wall Stand with dual 75" displays
- Two (2) Cisco PTZ 4K Cameras supporting Cinematic Meetings Cross View feature
- Vitra MedaMorph Trapezoid-shaped Conference Table
- Andreu World Nuez Chairs



Medium Collaboration Room – Dual Display

Components



Cisco Room Kit EQX



CISCO

Dual 75” Displays
(LG, Panasonic, Samsung, or Sony)



LG Panasonic SAMSUNG SONY


Vitra MedaMorph Trapezoid-shaped Conference Table





Table Finish: White MFC
Leg Finish: Polished Chrome

vitra.

Cisco PTZ 4K Camera

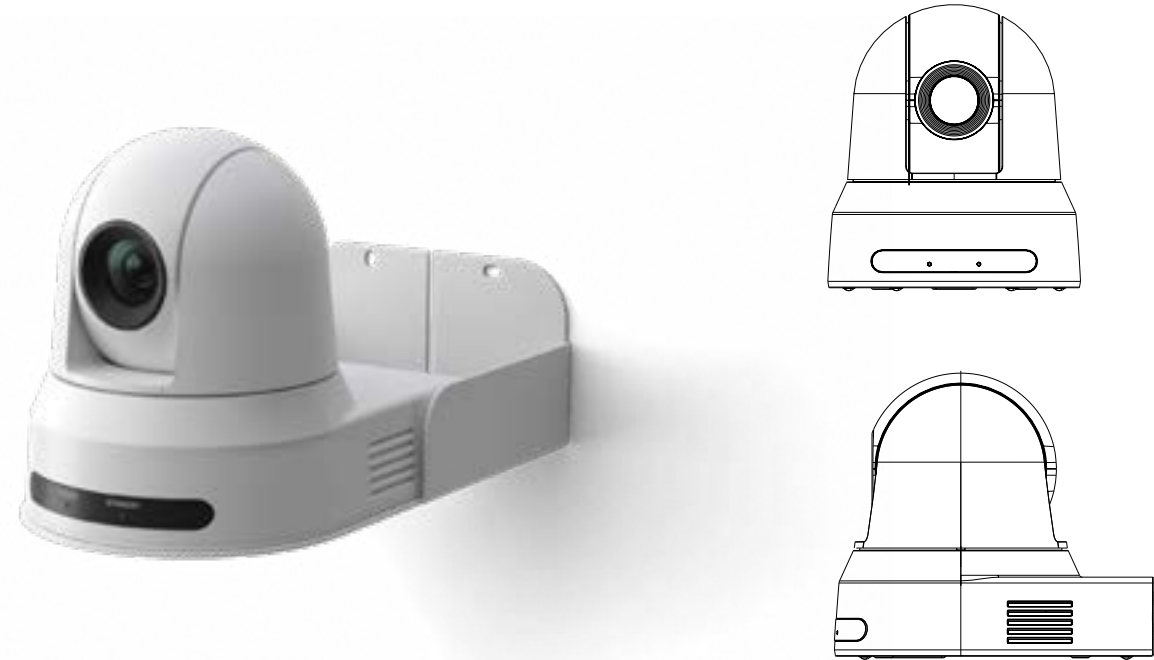

CISCO

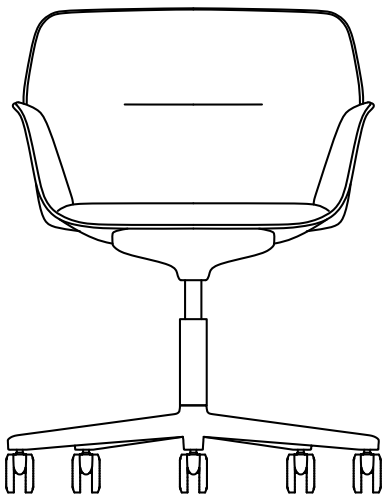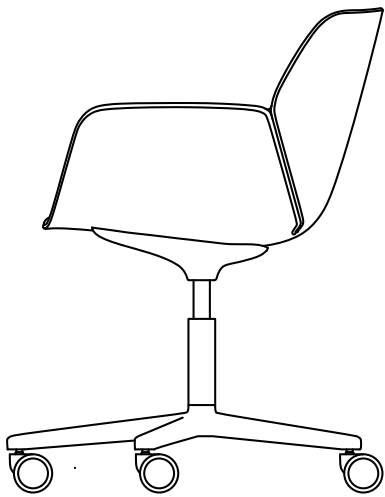


Andreu World Nuez Chair

Armrests: Tub
Base: 5 Star with Castors
Base Finish: Polished Chrome
Shell Finish: White
Upholstery: Gabriele Medley 66009
675mm W x 745mm H x 675mm D

Andreu World

Medium Collaboration Room - Dual Display

Room Layout

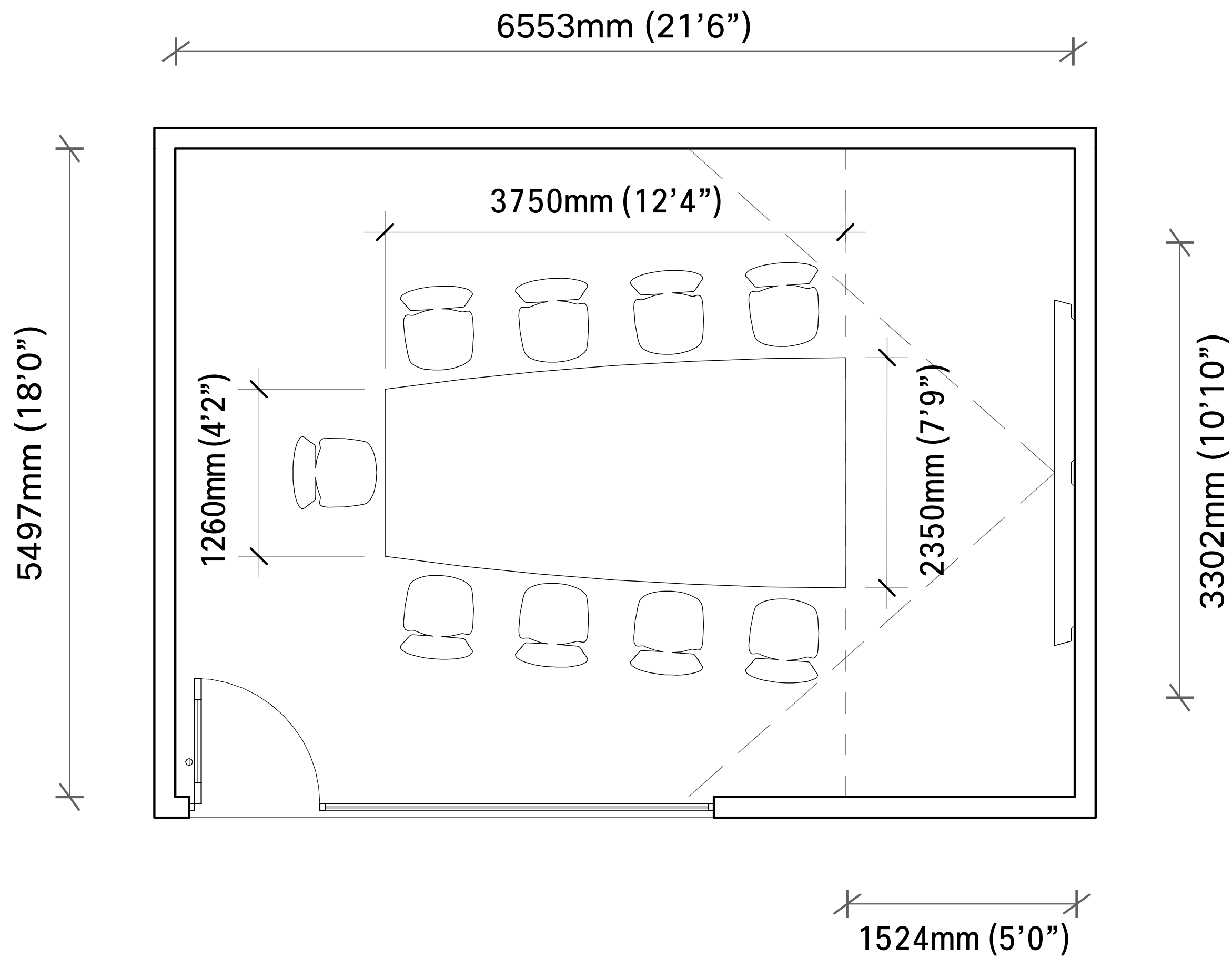

Medium Collaboration Room – Video Centric

Overview



The video-centric collaboration room is ideal for decision-making meetings. The horizontal table creates the effect of everyone sitting around a table. Dual 65" displays ensure that remote participants, as well as content, can be seen by all.

Features

- Cisco Room Bar Pro with dual 65" displays, wallmounted
- Vitra MedaMorph Table
- Andreu World Nuez Chairs



Medium Collaboration Room – Video Centric


Components



Cisco Room Bar Pro



Vitra MedaMorph Boat-shaped Conference Table

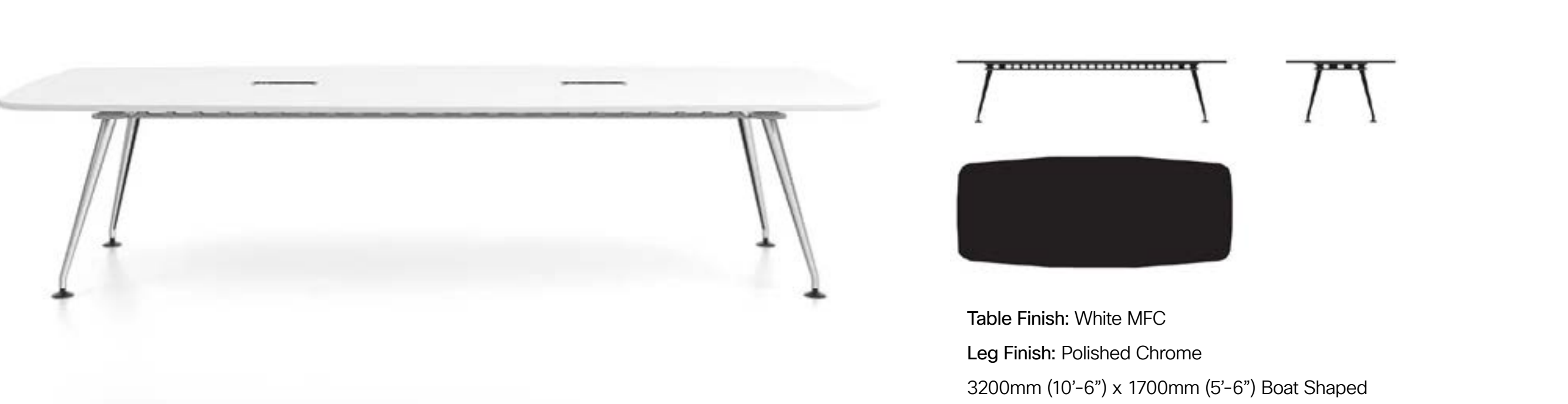

Dual 65" Displays

(LG, Panasonic, Samsung, or Sony)



CISCO

vitra.


Andreu World Nuez Chair



Armrests: Tub
Base: 5 Star with Castors
Base Finish: Polished Chrome
Shell Finish: White
Upholstery: Gabriele Medley 66009
675mm W x 745mm H x 675mm D

Medium Collaboration Room – Video Centric

Room Layout

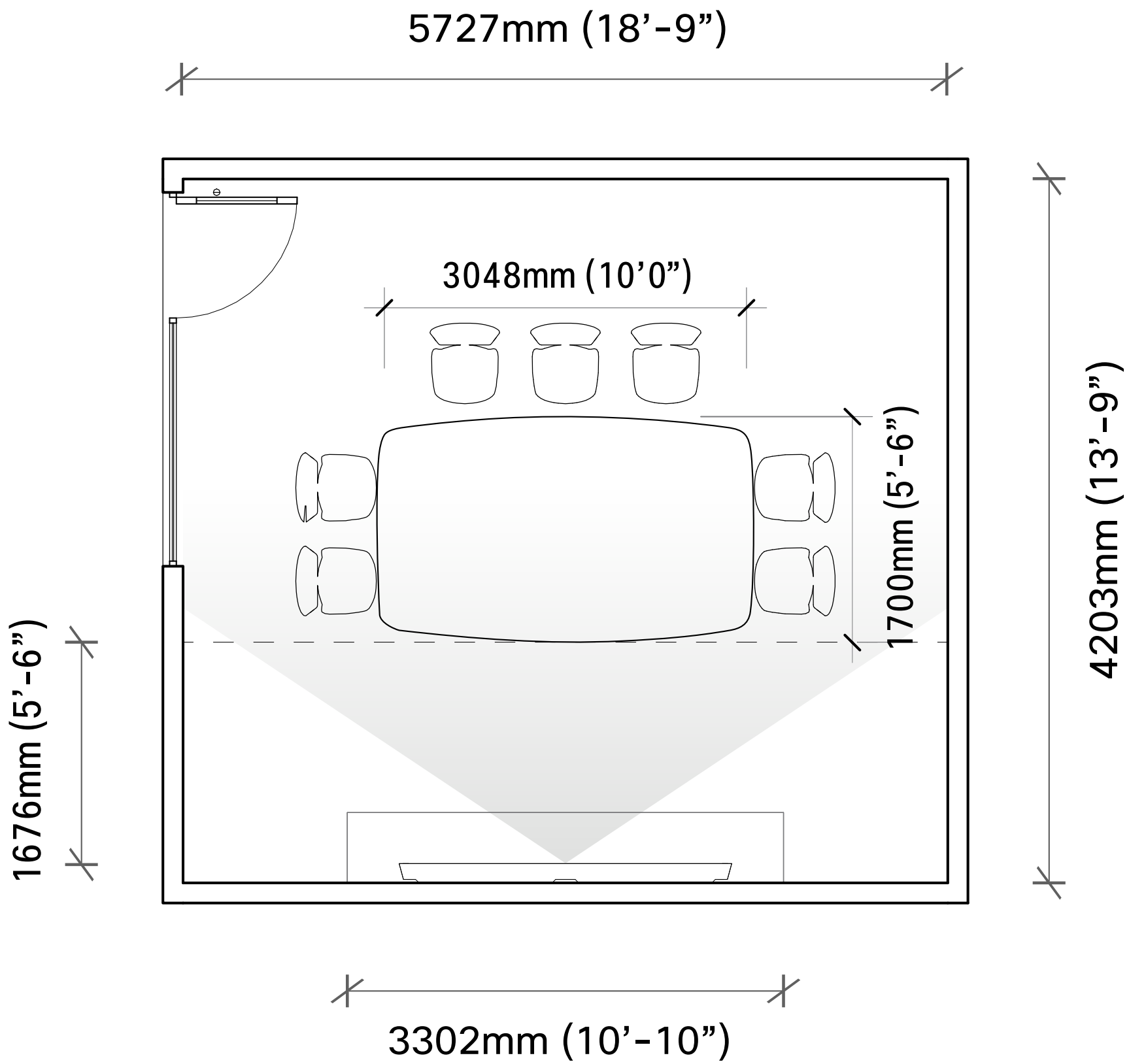

Note: Floor plan depicts suggested nominal size.

Training Room

Overview



Designed for delivering true hybrid learning events, this training room leverages two large displays, multiple cameras, and a Cisco Device feature called “Classroom Mode” to provide an unparalleled experience to all participants.

The solution supports multiple learning scenarios, including local presenter, remote presenter, and discussion mode.

Features

- Cisco Room Kit Pro with Dual 98” Displays (LG, Panasonic, Samsung, or Sony)
- Cisco Ceiling Microphones
- Rear mounted Cisco PTZ 4K Camera
- Rear mounted 65” display
- Third-party 6.5” ceiling speakers and amplifier
- Pedrali Tweet Stackable Chairs



Training Room

Components



Pedrali Tweet
894 Chair

Base: Sled
Base Finish: Aluminium
Table Finish: Black
Upholstery: Semi 4424 - Blue
530mm W x 805mm H x 520mm D

Cisco Board Pro 75



Cisco Room Kit Codec Pro




Dual 98” Displays



(LG, Panasonic, Samsung, or Sony)

CISCO

LG Panasonic SAMSUNG SONY

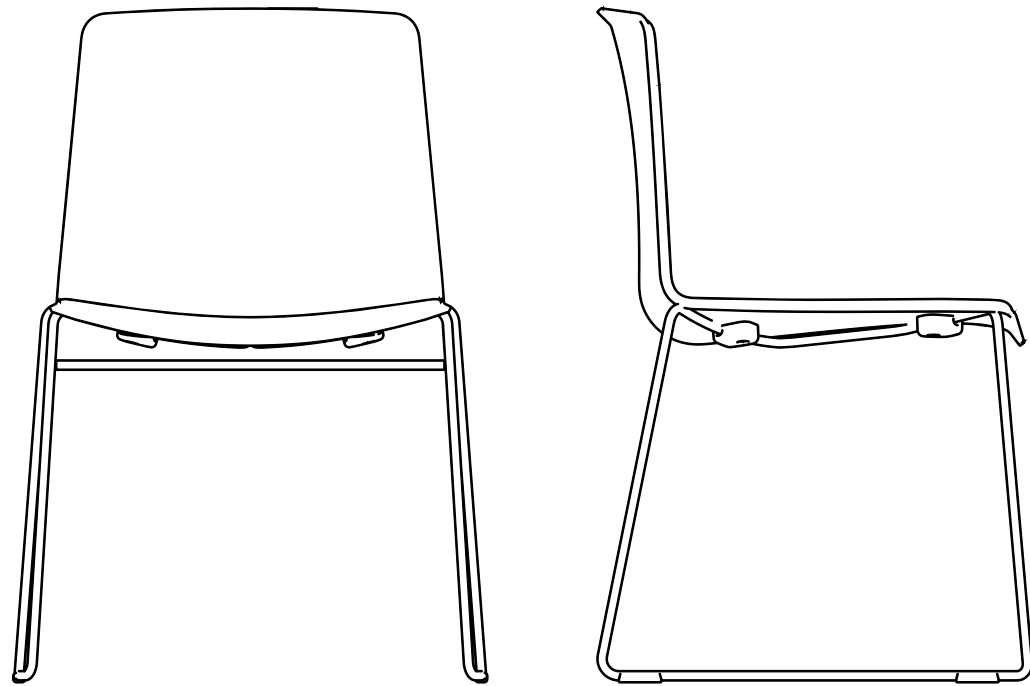


PEDRALI

Cisco Ceiling Microphones




Cisco PTZ 4K Camera

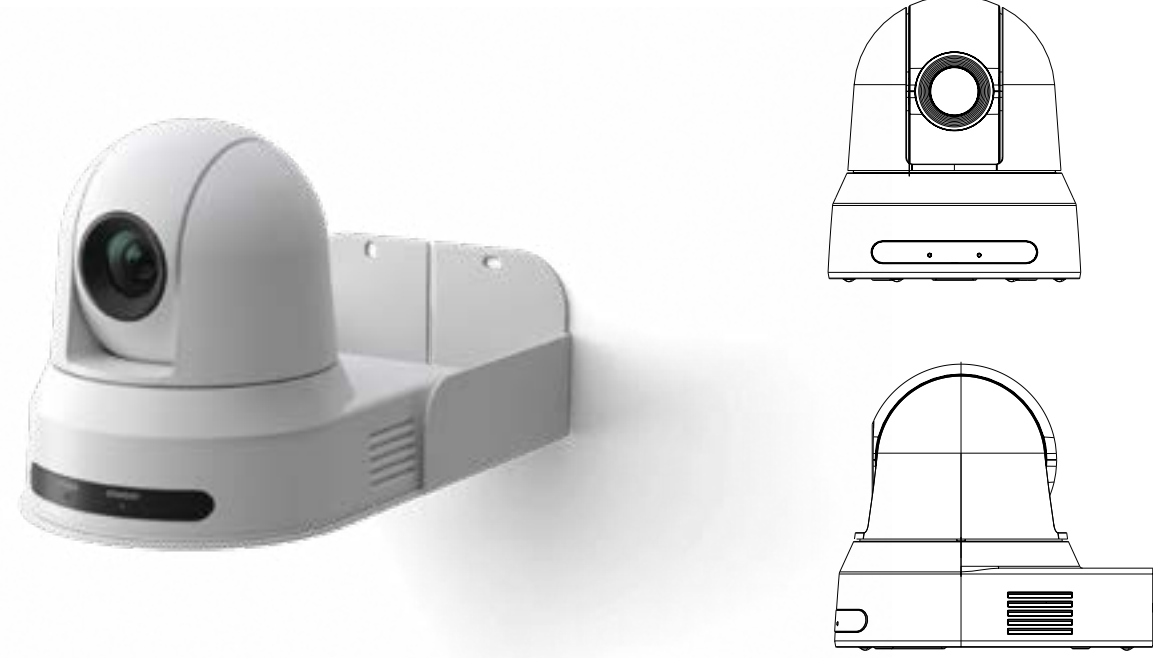

CISCO

Training Room

Room Layout

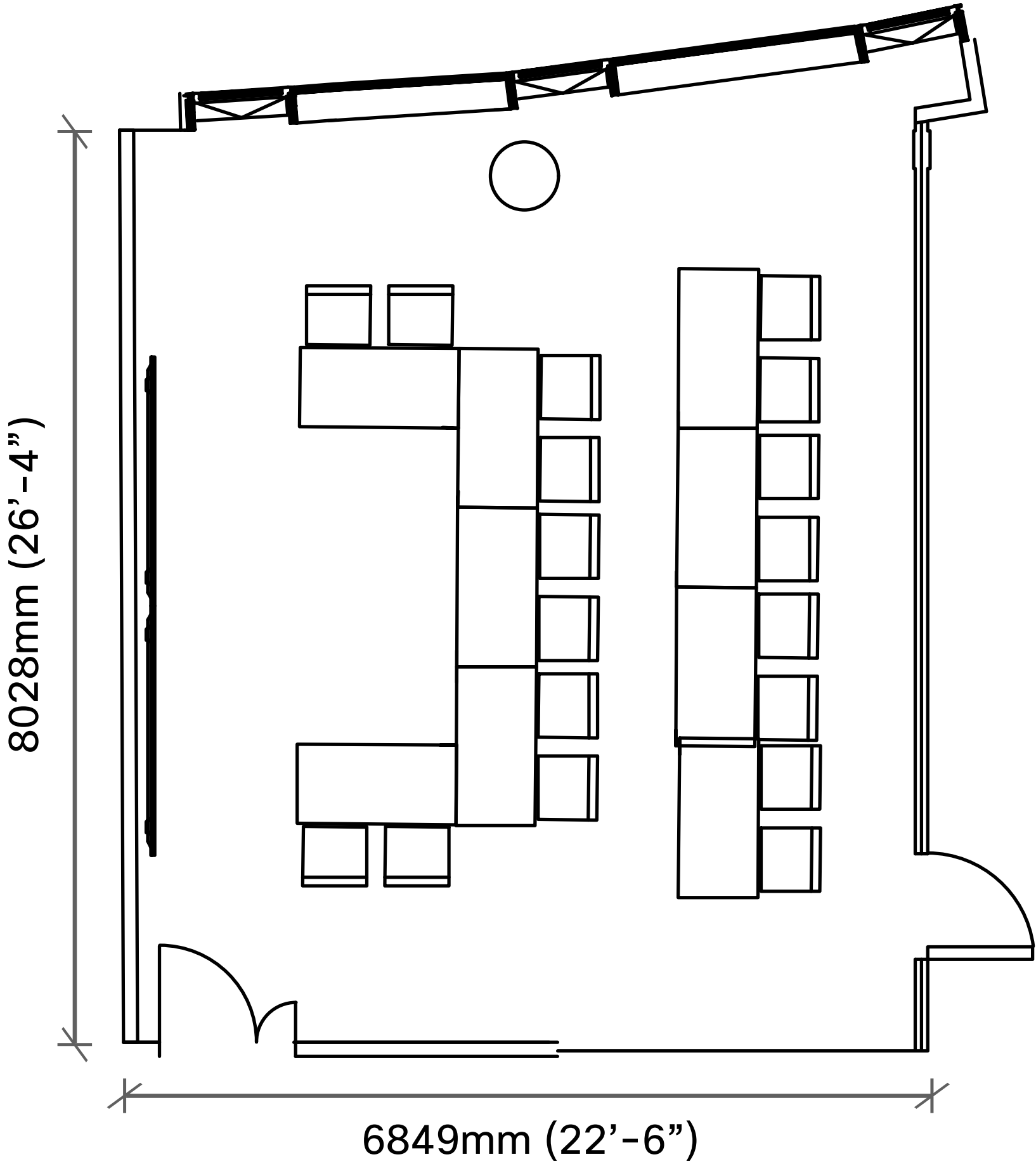



Resources

[Cisco.com](#)

[Cisco Workspaces](#)

[Best Practices for Creating Effective Video-enabled Rooms](#)

[Cisco Room Bar Pro Data Sheet](#)

[Cisco Room Kit EQX Data Sheet](#)

[Cisco Room Kit EQX Room Preparations Guide](#)

[Cisco Room Kit EQX Installation Guide](#)

© 2025 Cisco and/or its affiliates. All rights reserved. Cisco, the Cisco logo, Webex by Cisco, and Webex are trademarks or registered trademarks of Cisco and/or its affiliates in the U.S. and other countries. To view a list of Cisco trademarks, see the Trademarks page on the Cisco website. Third-party trademarks mentioned are the property of their respective owners. The use of the word “partner” does not imply a partnership relationship between Cisco and any other company. (2106R)

The intent of this document is to highlight the details, components and partners used in the creation of this office. Any reference herein to any specific commercial products or service does not necessarily constitute or imply its endorsement or recommendation.

Version 17 (June 8, 2025) © 2025 Cisco and/or its affiliates. All rights reserved.