

# Village Collection

- CONSTRUCTION** Steel doors with steel inlays
- THICKNESS** 2"
- INSULATION** R-8.7 and R-7.2 Polystyrene or non-insulated




NEW

# 2-Slat base




A LAYOUT, 2-SLAT BASE, 9' X 8', DARK WALNUT FAUX WOOD, WINDOWS WITH STOCKTON INSERTS


## Available layouts

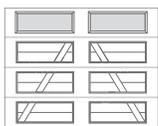

A LAYOUT

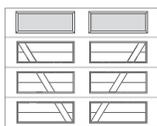

V LAYOUT

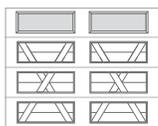

X LAYOUT



I-1 LAYOUT



I-2 LAYOUT



V LAYOUT, 2-SLAT BASE, 8' X 7', BLACK ICE, CLEAR WINDOWS


NEW

# 4-Slat base




X LAYOUT, 4-SLAT BASE, 9' X 7', WHITE, WINDOWS WITH STOCKTON INSERTS


## Available layouts

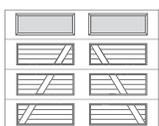

A LAYOUT

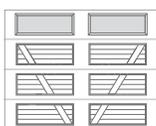

V LAYOUT

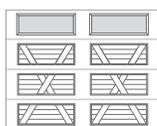

X LAYOUT



I-1 LAYOUT



I-2 LAYOUT




I-2 LAYOUT, 4-SLAT BASE, 10' X 8', SAHARA, CLEAR WINDOWS

# Flat base




V LAYOUT, FLAT BASE, 16' X 7', BLACK ICE, WINDOWS WITH STOCKTON INSERTS


## Available layouts

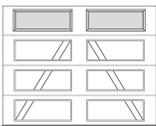


A LAYOUT

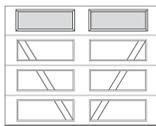


V LAYOUT

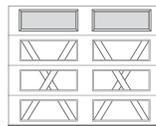

X LAYOUT

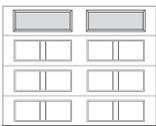

I-1 LAYOUT

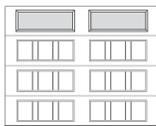

I-2 LAYOUT




V LAYOUT, FLAT BASE, 9' X 8', DARK WALNUT FAUX WOOD, WINDOWS WITH DOUBLE STOCKTON ARCH INSERTS

# Plank base




I-1 LAYOUT, PLANK BASE, 9' X 8', BROWN, WINDOWS WITH RICHMOND ARCH INSERTS


## Available layouts

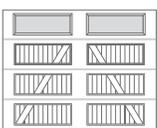


A LAYOUT

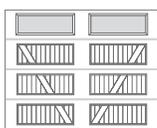


V LAYOUT

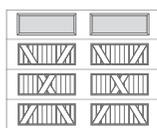

X LAYOUT

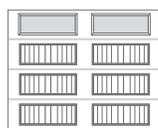

I-1 LAYOUT

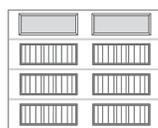

I-2 LAYOUT

## Enhance with decorative hardware

To find the perfect ones for you,  
build your door at [garaga.com/designcentre](https://garaga.com/designcentre).



STANDARD



COTTAGE



LIS



DOOR KNOCKERS



I-1 LAYOUT, PLANK BASE, 9' X 8', TERRASTONE, WINDOWS WITH STOCKTON INSERTS

# Charm and value with inlays

The Village Collection blends vintage elegance with modern design, featuring steel inlays and classic embossed patterns that echo the charm of swing doors. With over 20 designs, colors, and window options, these doors offer timeless style and affordability. For a perfect match, the inlays and the skin are made with the same steel.






A LAYOUT, FLAT BASE, 10' X 8', SAHARA, WINDOWS WITH RICHMOND INSERTS

## Colors




## Long windows (41" x 16")

### Decorative inserts

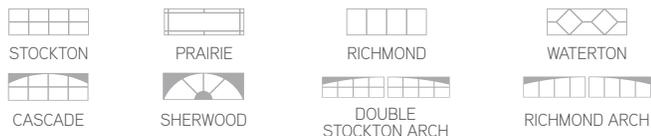

### Types of glass<sup>2</sup>


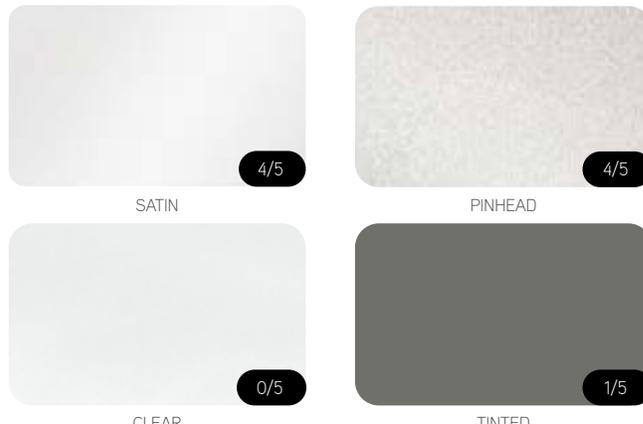


(0/5 = clear, 5/5 = opaque)

Same colors are available for the inlays.  
<sup>1</sup> Weathered Grey and Dark Walnut are uni-directional faux wood color patterns.

<sup>2</sup> Double-pane glass available for the Vantage construction.

## Construction details

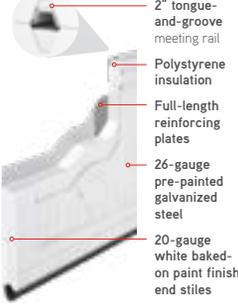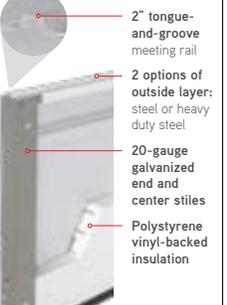Insulation level	Moderate (R-8.7)	Basic (R-7.2)	Non-insulated
Energy efficiency	● ● ●	● ●	
Soundproofing	● ● ●	●	
Rigidity	● ● ●	● ●	● ●
Models	Vantage	Regal	Regal
Construction	<p>2"</p> <p>3 layers with polystyrene insulation</p>  <ul style="list-style-type: none"> <li>2" tongue-and-groove meeting rail</li> <li>Polystyrene insulation</li> <li>Full-length reinforcing plates</li> <li>26-gauge pre-painted galvanized steel</li> <li>20-gauge white baked-on paint finish end stiles</li> </ul> <p><b>IMPORTANT</b> - Exterior face: light woodgrain finish. Interior face: stucco finish. Door interior: regardless of the color chosen, the inside is always White.</p> <p><b>WINDLOAD Option</b> This option is only available for specific regions. Talk to your garage door dealer for more information.</p>	<p>2"</p> <p>2 layers with polystyrene insulation</p>  <ul style="list-style-type: none"> <li>2" tongue-and-groove meeting rail</li> <li>2 options of outside layer: steel or heavy duty steel</li> <li>20-gauge galvanized end and center stiles</li> <li>Polystyrene vinyl-backed insulation</li> </ul>	<p>2"</p> <p>Non-insulated</p>  <ul style="list-style-type: none"> <li>2" tongue-and-groove meeting rail</li> <li>2 options of outside layer: steel or heavy duty steel</li> <li>20-gauge galvanized end and center stiles</li> </ul>

**Garage door sizes:** Standard widths, in 1" increments: from 8' to 20' for Vantage and Regal N24 constructions; from 8' to 18' for Regal N25 construction. See your garage door dealer for more details on oversized doors available. Vantage construction: For 8-feet height doors, four 24-inch panels. Regal construction: For 8-feet height doors, five 21-inch panels.

## Bases and colors

Constructions and colors	Bases			
	Flat base	Plank base	2-Slat base	4-Slat base
<b>Constructions</b>				
Vantage (Triple-layer)	●	●	●	●
Regal N24 (Heavy duty steel)	●	●	●	●
Regal N25 (Steel)		●		
<b>Colors</b>				
White	●	●	●	●
Almond	●	●	●	●
Sahara	●	●	●	●
Sandstone	●	●	●	●
Terrastone	●	●	●	●
Brown	●	●	●	●
Charcoal	●	●	●	●
Black Ice	●	●	●	●
Dark Walnut	●	●	●	●
Weathered Grey	●	●	●	●

● = Available colors for Vantage, Regal N24 and Regal N25  
 ● = Available colors for Vantage and Regal N24

## Warranty

**Vantage:** Door sections: limited lifetime. Weatherstripping: 1 year. Bolted Hardware: 1 year. Windows: 10 years against seal defects and 1 year for thermal break. **Regal:** Door: 15 years (limited). Weatherstripping: 1 year. Bolted Hardware: 1 year.

# LiftMaster

## Smart and quiet openers

POWERED BY myQ

### ELITE SERIES®



- Ultra quiet
- Belt or chain drive
- ¾ HP, AC or DC power
- Integrated camera for some models



- Ultra quiet
- Jackshaft
- DC power

### PREMIUM SERIES®



- Quiet
- Belt or chain drive
- ½ HP, AC or DC power

### CONTRACTOR SERIES®



- Belt or chain drive
- ½ HP, AC or DC power

# GARAGA®

1 800 464-2724  
 info@garaga.com  
 garaga.com

logo FSC

**YOUR  
 GARAGA  
 DISTRIBUTOR**