



Garage doors
made easy.





Garage doors made easy, just for you.

Get ready to breeze through your garage door task with these latest trends and simple steps. You'll have it checked off your list in no time so you can take your home one step closer to perfection.

1. Do you have a design in mind?

Whether you pick one of our stylish models or choose to unleash your creativity, our dedicated team is here to guide you every step of the way.

2. How do you use your garage?

Whether you use your garage as a gym, mudroom, or simply for parking, we will recommend the right components and thermal insulation to reduce energy costs while staying within your budget.

3. When do you want it installed?

On the scheduled day, our experts will install your new door, configure its sensors, and ensure everything works smoothly before leaving your home as clean as they found it.

And you're done!

MODERNO 2 BEADS DESIGN, BLACK, SLIM WINDOWS IN RIGHT-SIDE HARMONY

Table of contents

- Your garage door made easy..... 3
- Doors with PVC overlays..... 4
- Doors with inlays..... 6
- Full-view doors..... 8
- Versatile Shaker designs 10
- Most popular classic designs.....12
- Garage door and entry door matches.....14
- Windows and glass options.....16
- Faux wood colors.....18
- Trendy solid colors.....20
- Distinctive patterns 22
- Five insulation levels.....23
- Garage door openers.....24
- Why Garaga25
- Line-up overview..... 26

Luxurious and elegant overlays

Elevate your home's exterior with our exclusive Townships Collection. Combine steel doors with refined PVC overlays that merge timeless charm with modern strength. Designed to enhance any home's style, these doors add lasting value and create an inviting, sophisticated look that will make every arrival feel special.

EASTMAN E-13 DESIGN, BLACK DOORS AND OVERLAYS, 4 VERTICAL LITE PANORAMIC WINDOWS



PRINCETON P-23 DESIGN, DESERT SAND DOORS AND OVERLAYS, 8 LITE PANORAMIC WINDOWS

Scan to see all the available options



PRINCETON P-31 DESIGN, CHOCOLATE WALNUT FAUX WOOD DOORS AND OVERLAYS, 4 LITE PANORAMIC WINDOWS

Numerous color, window, and PVC overlay design options such as these 4 beloved ones:



PRINCETON P-22 DESIGN



EASTMAN E-21 DESIGN



PRINCETON P-11 DESIGN



CAMBRIDGE CM DESIGN





Numerous color, inlay, and door design options such as these popular ones:



X-LAYOUT DESIGN, 4-SLAT BASE



A-LAYOUT DESIGN, 2-SLAT BASE



V-LAYOUT DESIGN, PLANK BASE



I-2 LAYOUT DESIGN, FLAT BASE

Charm and value with inlays

The Village Collection blends vintage elegance with modern design, featuring steel inlays and classic embossed patterns that echo the charm of swing doors. With over 20 designs, colors, and window options, these doors offer timeless style and affordability.

Scan to see all the available options



A-LAYOUT DESIGN, 2-SLAT BASE, DARK WALNUT FAUX WOOD, WINDOWS WITH STOCKTON INSERTS



V-LAYOUT DESIGN, 2-SLAT BASE, BLACK ICE, CLEAR WINDOWS



A-LAYOUT DESIGN, FLAT BASE, SAHARA, WINDOWS WITH RICHMOND INSERTS

X-LAYOUT DESIGN, 4-SLAT BASE, WHITE, WINDOWS WITH STOCKTON INSERTS

Indoor/outdoor statement with a full-view door

Transform your space with our California full-view door. Its sleek, modern design effortlessly connects your indoor and outdoor areas. Conjuring light and elegance by day, it evolves into a glowing architectural statement at night. Customizable with frame colors and glass options, full-view doors are not insulated.

CALIFORNIA, BLACK FRAME, WHITE SANDBLASTED GLASS




CALIFORNIA, BLACK FRAME, CLEAR GLASS

Scan to see all the available options



COVERED PATIO HAS A FULL-VIEW NON-INSULATED DOOR WITH A BLACK FRAME, AND CLEAR GLASS


Numerous frame color and glass options such as these 4 bold ones:

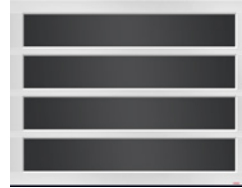


WHITE FRAME, BLACK SATIN GLASS



DARK SAND FRAME, BRONZE TINTED GLASS

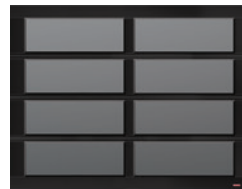


IRON ORE FRAME, GREY SANDBLASTED GLASS

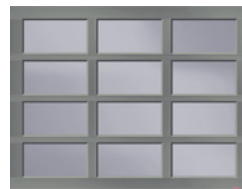

CHARCOAL FRAME, WHITE SANDBLASTED GLASS



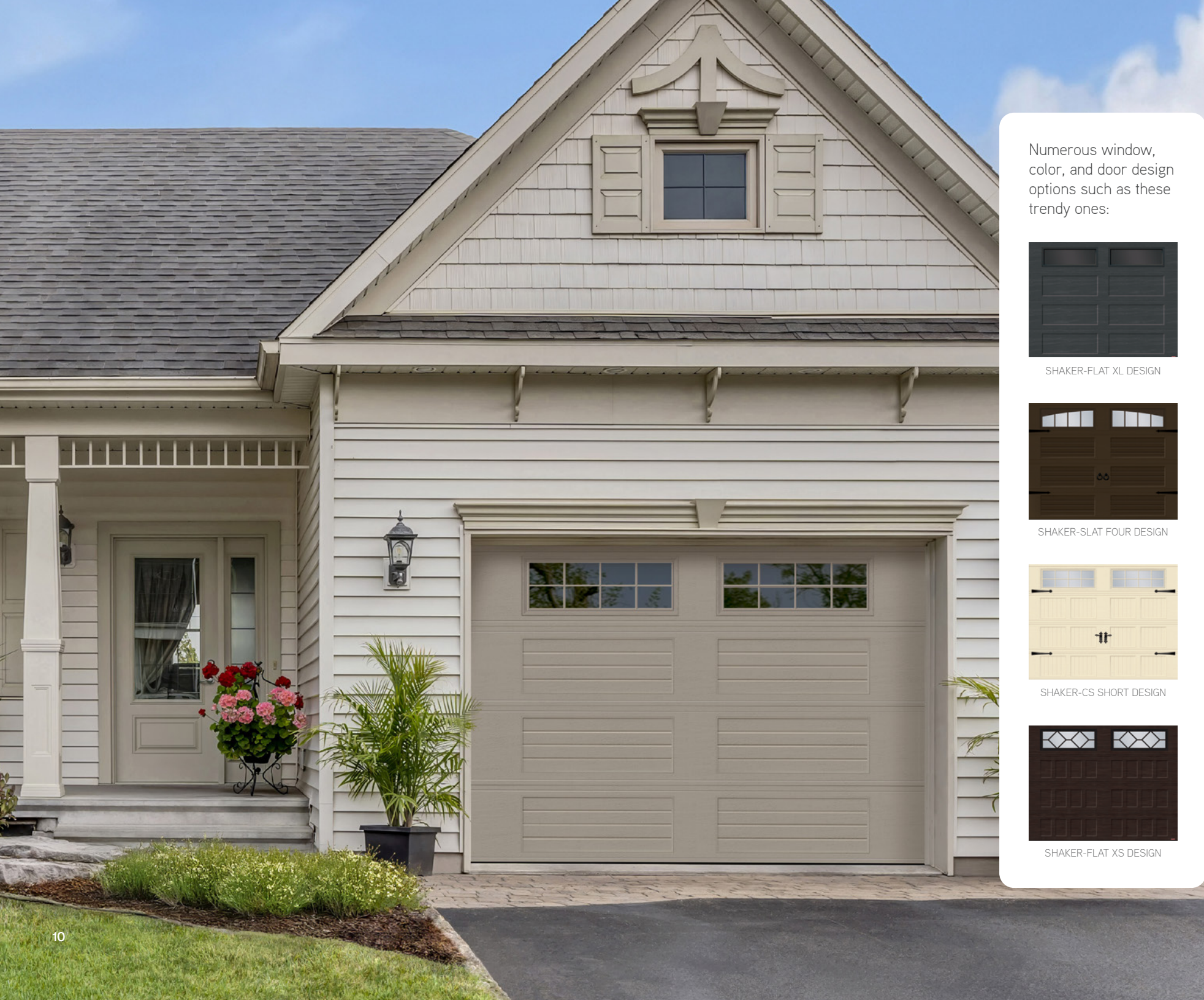


Numerous window, color, and door design options such as these trendy ones:



SHAKER-FLAT XL DESIGN



SHAKER-SLAT FOUR DESIGN

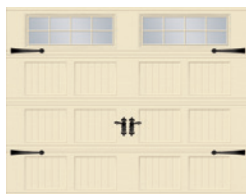

SHAKER-CS SHORT DESIGN



SHAKER-FLAT XS DESIGN

Shaker designs for versatility and style

Embrace the elegance of our Shaker designs, a perfect blend of simplicity and sophistication. Our embossed steel doors offer unique designs — from the sleekest embosses, for a modern twist, to more intricate patterns that provide depth and texture. Shaker doors adapt effortlessly to your home's character, delivering both style and substance. Discover how these designs enhance your space and find your perfect match on garaga.com/designcentre.



SHAKER-FLAT CC DESIGN, BLACK

SHAKER-SLAT FOUR DESIGN, SANDSTONE, WINDOWS WITH STOCKTON INSERTS

SHAKER-SLAT FOUR DESIGN, WHITE, WINDOWS WITH RICHMOND ARCH LONG INSERTS, DECORATIVE HARDWARE



SHAKER-MODERN XL DESIGN, WEATHERED GREY FAUX WOOD

Popular classics. Sure values.

These designs have earned their place as customer favorites, embodying classic appeal that stands the test of time. Perfect for homes with a timeless aesthetic, these doors provide a touch of elegance that complements tradition. Available in many color and window options, they bring dependable value and style. Discover why so many people trust these enduring choices by trying them out at garaga.com/designcentre with a picture of your house.

NORTH HATLEY SP DESIGN, ICE WHITE,
8 LITE ORION WINDOWS



CLASSIC XL DESIGN, WHITE, RIGHT-SIDE
HARMONY WINDOWS, TINTED GLASS



CLASSIC XL DESIGN, MOKA BROWN,
LEFT-SIDE HARMONY WINDOWS



CLASSIC CC
DESIGN, BLACK



GARAGE DOOR: VOG DESIGN, BLACK
COORDINATED WITH VOG ENTRY DOOR FROM NOVATECH

Garage door and entry door: a perfect match

Achieve a flawless, harmonious look by teaming these Garaga garage door designs with Novatech entry doors, an ecosystem that brings you top quality and value. Create a cohesive exterior that reflects your style and attention to detail. From elegant classics to exclusive modern designs, they help you complete this project with pride and ease.

Novatech®

Scan to explore these duos

GARAGE DOOR: PRESTIGE XL DESIGN, CLAYSTONE, 8 LITE ORION WINDOWS
COORDINATED WITH PRESTIGE ENTRY DOOR FROM NOVATECH.



GARAGE DOOR: SHAKER-MODERN XL DESIGN, BLACK, SOFT WINDOWS
COORDINATED WITH SOHO ENTRY DOOR FROM NOVATECH


Let there be light — add windows

Enhance your garage with natural light to create a warm and inviting space. With over 20 types of glass and decorative inserts to choose from, you can check off this project with pride, knowing you've added both style and value to your home. Achieve seamless harmony with matching glass and frames in our garage doors and Novatech entry doors. Our windows are available in four sizes: Slim, Short, Long and Panoramic.

Scan to see all the available options




Decorative inserts

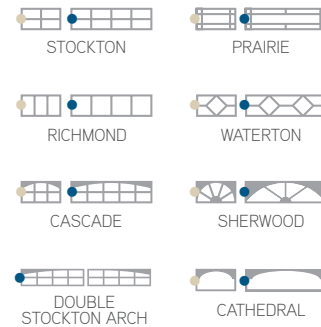

● = Inserts for Short windows ● = Inserts for Long windows

Stained glass

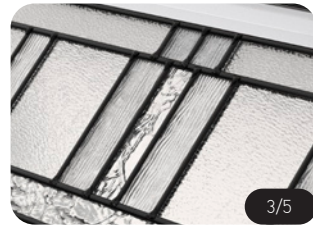

CACHET



CELESTE

Types of glass



ZEN



 
PURE



MASTERLINE



AZUR



SCREEN



WHITE SANDBLASTED



GREY SANDBLASTED



BLACK SATIN



CLEAR



TINTED

Novatech

Match your garage door glass with your entry door glass. More than 20 options.

(1/5 = clear, 5/5 = opaque)

FLUSH DESIGN, BLACK, LEFT-SIDE HARMONY WINDOWS, ZEN GLASS







Four Faux Wood Colors



DARK WALNUT

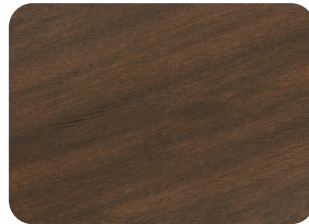

CHOCOLATE WALNUT

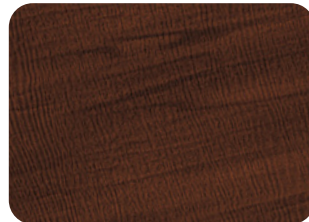

AMERICAN WALNUT



WEATHERED GREY

The look of wood, without the upkeep

Available in four stunning faux wood colors, our steel garage doors capture the character of natural wood with none of the hassle. From deep, rich tones to weathered elegance, these finishes add warmth and sophistication to any home and are available with most of our door designs. Ready to enhance your home's appearance? Try them on garaga.com/designcentre.



VOG DESIGN, WEATHERED GREY FAUX WOOD, BLACK SATIN WINDOWS



NORTH HATLEY LP DESIGN, AMERICAN WALNUT FAUX WOOD, 4 LITE ORION WINDOWS



SHAKER-FLAT XL DESIGN, CHOCOLATE WALNUT FAUX WOOD, WINDOWS WITH STOCKTON INSERTS


NORTH HATLEY LP DESIGN, DARK WALNUT FAUX WOOD, CLEAR WINDOWS

Make it yours with color

With a selection of 10 stunning solid colors available in most of our designs and insulation levels, you can effortlessly create a harmonious exterior. From sleek Iron Ore and Charcoal to modern Black, and classic White, Almond, or Moka Brown, our colors are crafted to complement Gentek and other top exterior brands. Select a color that mirrors your window frames, entry door, or shutters, creating a harmonious, sophisticated look. Ready to find your match? Try them all on garaga.com/designcentre.



SHAKER-SLAT TWO DESIGN, SANDSTONE, CLEAR WINDOWS, DECORATIVE HARDWARE

	
IRON ORE	CHARCOAL
	
ICE WHITE / WHITE	DESERT SAND / ALMOND
	
MOKA BROWN / BROWN	BLACK / BLACK ICE
	
CLAYSTONE / SANDSTONE	SAHARA
	
DARK SAND / TERRASTONE	EVERGREEN

Some colors are not available with all styles and insulation levels. Check with your dealer for availability.

VOG DESIGN, IRON ORE, SLIM WINDOWS IN RIGHT-SIDE HARMONY



Distinctive patterns

Get an up-close look at the patterns that make our steel garage doors truly distinctive. From classic carriage house and traditional patterns to sleek, modern choices, each close-up reveals the craftsmanship and depth that bring character to any exterior.



VOG



SHAKER-MODERN



PRESTIGE



CLASSIC



FLUSH



MODERNO



SHAKER-FLAT



SHAKER-SLAT



SHAKER-CS



NORTH HATLEY



GROOVED



SHAKER-FLAT XS



PVC OVERLAYS



STEEL INLAYS

N Perfectly match your garage door with your entry door with these three designs: Vog, Shaker-Modern, and Prestige.

5 insulation levels

With five insulation levels to choose from, Garaga makes it easy to select the right fit for your garage use. Whether you need energy efficiency, sound-proofing, or enhanced rigidity, our options are tailored to keep your family comfy year-round.

Insulation level	Best (R-16)	High (R-12)	Moderate (R-8.7)	Basic (R-7.2)	Non-insulated	Non-insulated
Energy efficiency	●●●●●	●●●●	●●●	●●		
Soundproofing	●●●●●	●●●●	●●●	●		
Rigidity	●●●●●	●●●●	●●●	●●	●●	●●●●●
Models	Townships and Standard+	Acadia 138	Vantage and Village	Regal and Village	Regal and Village	California
Construction	1 3/4" 3 layers with polyurethane insulation 	1 3/8" 3 layers with polyurethane insulation 	2" 3 layers with polystyrene insulation 	2" 2 layers with polystyrene insulation 	2" Non-insulated 	1 3/4" Full vision door

Smart door opener. No-brainer!

Experience a smarter, more secure garage with LiftMaster openers. Control your door remotely on your cell phone or your car's computer with the myQ app, and monitor your belongings with a built-in camera. Stay prepared for power outages with reliable battery backup. With Amazon Key compatibility, enjoy safe in-garage deliveries protected from theft and bad weather. LiftMaster combines convenience, safety, and some of the quietest openers on the market. Talk to a Garaga expert near you to find the perfect opener for your needs.



Why Garaga

A family-owned business with four plants, more than 1,000 locations across the US and Canada, and over 1,500 employees dedicated to offering the best garage door products and services.



Energy efficiency

Our garage doors offer five insulation levels to suit your garage usage and budget. From no insulation to R-16, whether you live in cold, warm or seasonable weather, we've got you covered.

Hassle-free products

For durability and security, Garaga's strong construction has reliable hardware and sensors, up to 2" thick doors, interlocking joints and full height stiles on the sections or high-pressure injected polyurethane foam.

Unlimited design options

Transform your home with a custom garage door that perfectly complements your architectural style and color scheme, and see how well it enhances your curb appeal!

Doors paired for your home

Achieve a cohesive, harmonious look with Garaga garage doors and Novatech entry doors. Thanks to our exclusive ecosystem of products, we flawlessly match designs, frames, and windows, creating a stunning, unified exterior.

Illustrated and detailed quotes

We quickly provide professional quotations that include an image of the garage door as it would be installed on your house to make sure the product you select creates the effect you are looking for.

A perfect installation

Our expert technicians will install your door, ensure the sensors are all set up, and get it running smoothly and quietly. Then they'll leave your home as clean as they found it - it's that simple.


Endless possibilities for every budget

Here is a selection of popular designs classified by style and by price, to guide your shopping. Contact a Garaga Expert for free quotes or to simply explore the endless possibilities with an expert.

Scan to see all the available options



Traditional doors

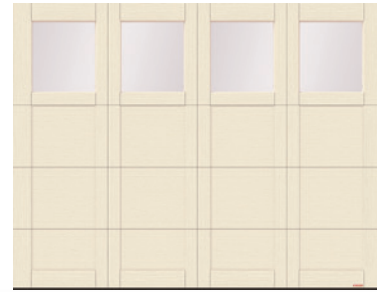

PRINCETON P-31 DESIGN



EASTMAN E-12 DESIGN



PRESTIGE XL DESIGN



SHAKER-FLAT CC DESIGN



CLASSIC SHORT DESIGN



SHAKER-FLAT XL DESIGN


Carriage house doors



PRINCETON P-22 DESIGN



EASTMAN E-21 DESIGN

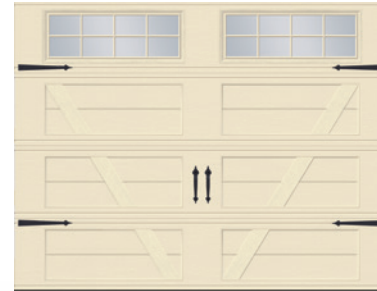

VILLAGE V LAYOUT 2-SLAT BASE DESIGN



NORTH HATLEY LP DESIGN



SHAKER-FLAT XS DESIGN



NORTH HATLEY SP DESIGN


Contemporary doors




CALIFORNIA DESIGN



CAMBRIDGE CL DESIGN

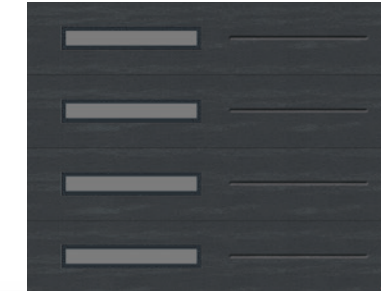


VOG DESIGN

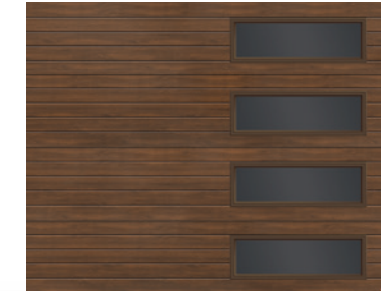

MODERNO MULTI DESIGN



FLUSH DESIGN

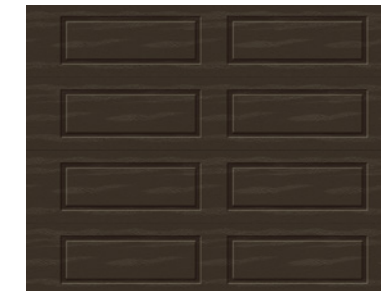

SHAKER-MODERN XL DESIGN

\$\$\$\$

\$\$\$

\$ or \$\$ (depending on the level of insulation)

Ready to select your door?

Here are different ways to proceed:

- 1 Use the Design Centre to visualize different garage doors on a photo of your home, allowing you to experiment with numerous styles, colors, and finishes. Visit garaga.com/designcentre
- 2 If you'd like to see colors and samples, stop by your local dealer. See dealer locations at garaga.com/find-a-dealer
- 3 Already know what you want? Request a quote from your local dealer for quick pricing, with multiple options provided for a range of choices.

Get a quote



The colors are as exact as printing allows. The clarity of the wood grain and designs is optimized to provide a photographic rendering, not identical to the actual appearance. Please request a color sample. Trademarks and registered trademarks of Garaga Inc. are denoted by ™, ® and © respectively. © Garaga Inc. 2025 - All rights reserved - Printed in Canada - 9570106/2025



1 800 464-2724
info@garaga.com
garaga.com

YOUR
GARAGA
DISTRIBUTOR

For DIY projects,
scan to review how
to take measurement.



logo FSC