

# ARTISTIC CHIC




BRAND NEW  
DESIGN COLLECTION  
CREATED BY *PIERRE GONALONS*

PIERRE GONALONS A DISTINGUISHED FRENCH INTERIOR DESIGNER AND ARCHITECT, RANKS AMONG THE TOP 100 DESIGNERS RECOGNIZED BY AD MAGAZINE.

GONALONS IS RENOWNED FOR HIS DISTINCTIVE RETRO-ROMANTIC APPROACH TO DESIGN, WHICH SEAMLESSLY MERGES MINIMALIST AESTHETICS WITH AN EVOCATIVE DIALOGUE BETWEEN THE PRESENT AND THE PAST.


THE CABARET COLLECTION EMERGED FROM A CREATIVE PARTNERSHIP BETWEEN PIERRE GONALONS' DESIGN STUDIO AND BUREAU MAYTONI, ENCAPSULATING THE ESSENCE OF A MODERN CABARET—AN ARTISTIC MILIEU STEEPED IN LIGHT-HEARTED ELEGANCE AND REFINED INTRICACIES. THE LUMINAIRES IN THIS COLLECTION FEATURE SMOOTH, FLOWING LINES INSPIRED BY THE GRACEFUL MOVEMENTS OF DANCE AND THE IMPECCABLE PROPORTIONS OF HAUTE COUTURE. THE PLAFOND'S SILHOUETTE EVOKES A SENSE OF GRACEFUL NUDITY INTERTWINED WITH THE DYNAMIC ELEGANCE OF WEIGHTLESS TEXTILES. AT THE HEART OF THIS SERIES LIES THE TABLE LAMP, SETTING THE INTIMATE AMBIANCE OF A WARMLY LIT TABLE—A SANCTUARY SUFFUSED WITH THE ANTICIPATION OF AN UNFORGETTABLE PERFORMANCE THAT PROMISES TO CAPTIVATE EVERY GUEST.

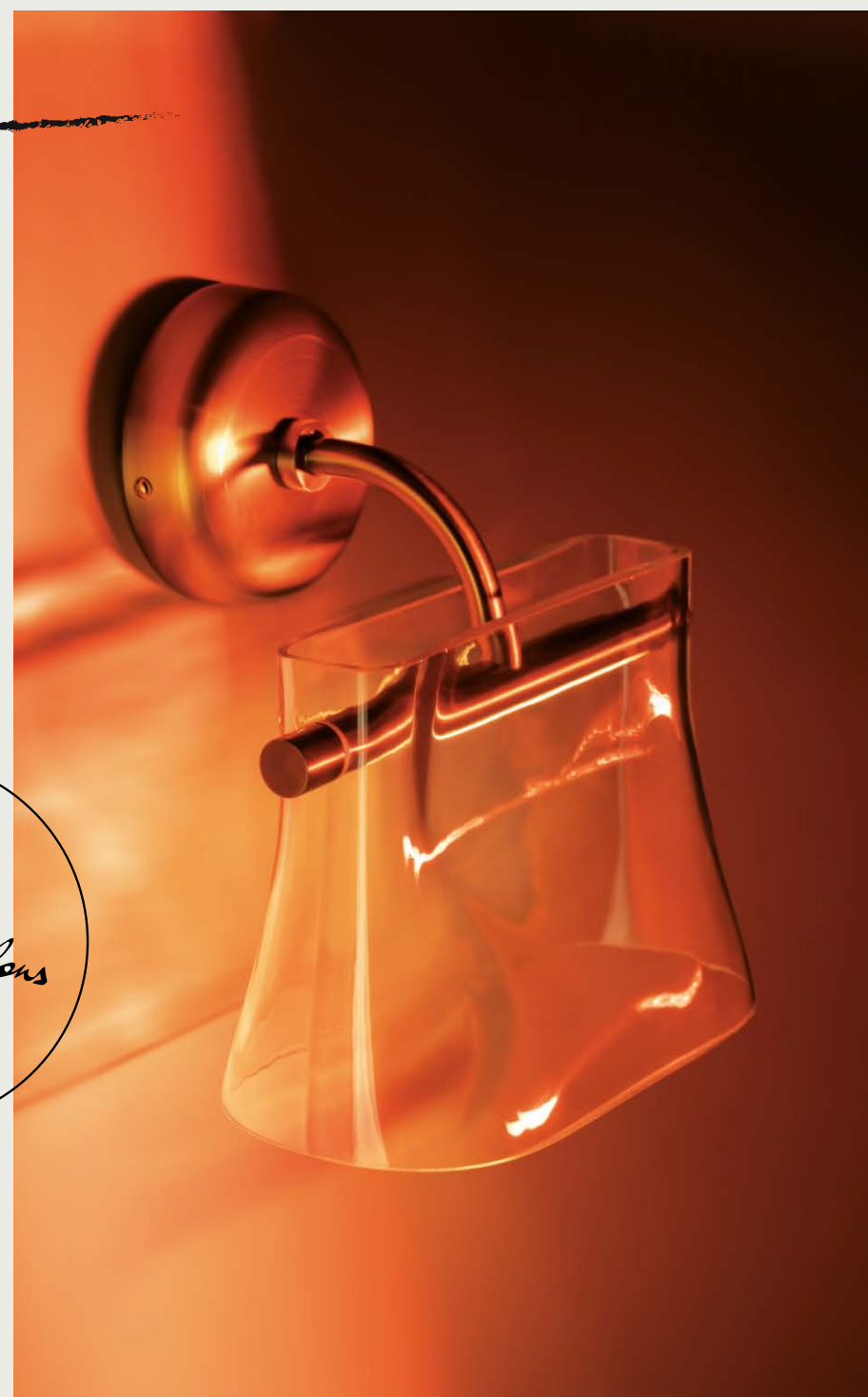

IN COLLABORATION  
WITH *MAYTONI BUREAU*

# INSIDE CABARET
 
## Cabaret



■ The color of the metal fittings is brass with a satin finish, the lampshades are made of clear glass. Light source: LED. The color temperature of the lamps is 3000K, the beam angle is 120 degrees. Wall sconces and pendant lights are equipped with an adjustable electric cord up to 3 meters long, allowing them to be used in rooms with high ceilings.

■ Die Farbe der Metallhalterung - Messing, satiniert - und die Plafonds - trans parentes Glas. Lichtquelle: LED. Die Farbtemperatur der Leuchten beträgt 3000 K und der Abstrahlwinkel 120 Grad. Wand- und Pendelleuchten sind mit einer einstell baren Kabellänge von

■ Il colore della struttura metallica è ottone con finitura satinata, i paralumi sono in vetro trasparente. Sorgente luminosa: LED. Temperatura colore delle lampade è 3000K, angolo di diffusione è di 120 gradi. Le applique e le lampade a sospensione sono dotate di cavo regolabile fino a 3 metri di lunghezza, il che consente di utilizzarle in ambienti con soffitti alti.




 
■ La couleur de la structure métallique est laiton avec une finition satinée, les plafonniers sont en verre transparent. Source lumineuse: LED. La température de couleur des lampes est 3000K, l'angle de dispersion est de 120 degrés. Les appliques murales et les luminaires à suspension sont équipées d'un câble réglable pouvant atteindre 3 mètres de long, ce qui leur permet d'être utilisées dans des pièces avec des plafonds hauts.



1 ■ **MOD170FL-L8BS3K**  
LED 8W 850 lm  
t° 3000K >80Ra 120°  
IP 20

2 ■ **MOD170PL-L24BS3K**  
LED 20W 2050lm  
t° 3000K >80Ra 120°  
IP 20

3 ■ **MOD170PL-L8BS3K**  
LED 8W 850 lm  
t° 3000K >80Ra 120°  
IP 20

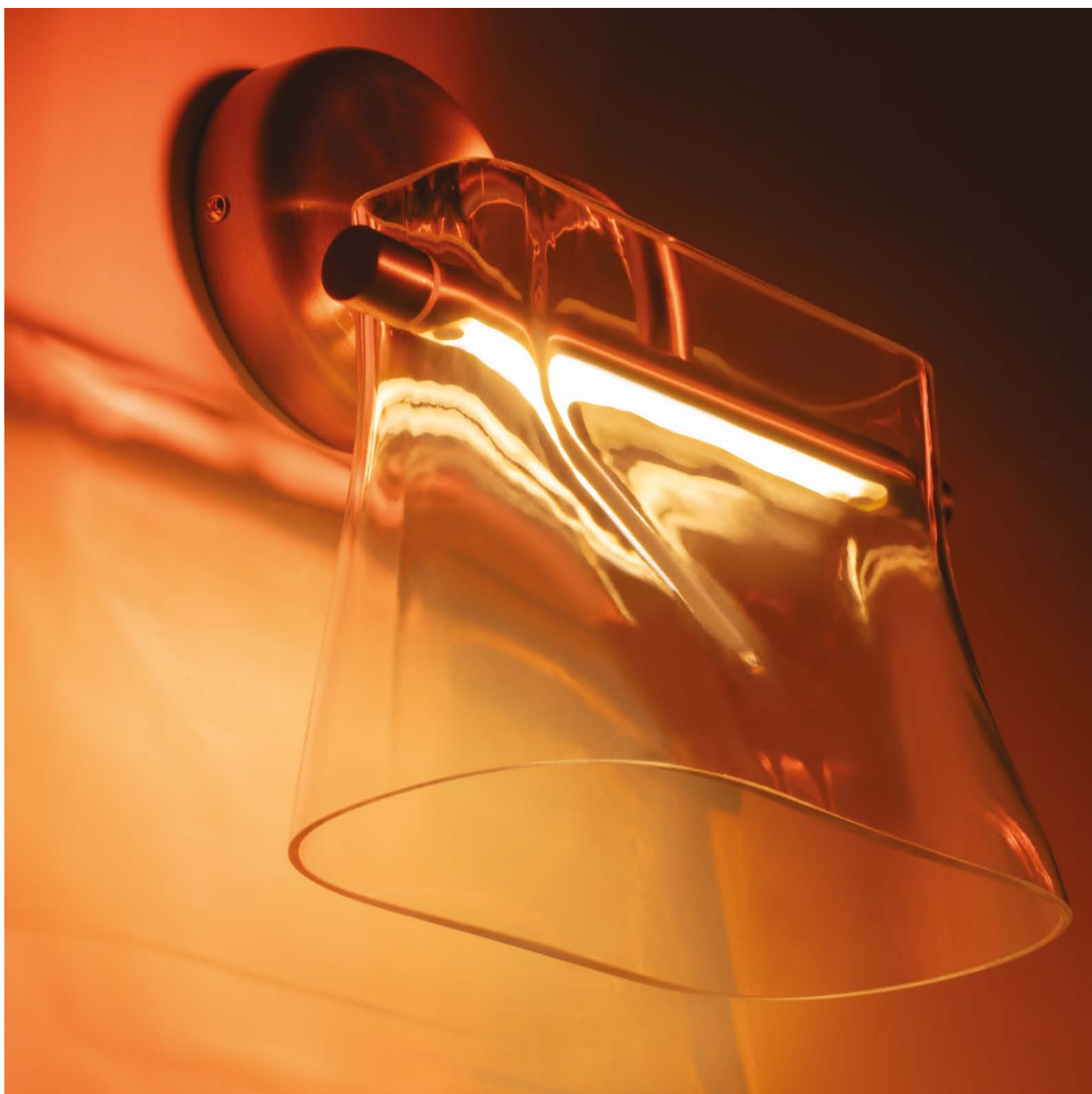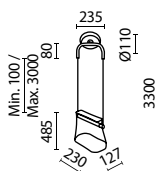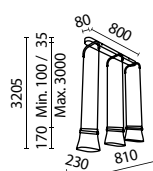

MOD170WL-L8BS3K2

4 ■ **MOD170TL-L8BS3K**  
LED 8W 850 lm  
t° 3000K >80Ra 120°  
IP 20

5 ■ **MOD170WL-L8BS3K2**  
LED 8W 850lm  
t° 3000K >80Ra 120°  
IP 20

6 ■ **MOD170WL-L8BS3K1**  
LED 8W 850lm  
t° 3000K >80Ra 120°  
IP 20

