

SIMES



BRONZE
Collection

Collezione Bronzo Bronze Collection

La collezione Bronzo nasce dall'incontro tra design, ingegneria e cultura del materiale. Ogni corpo illuminante è tornito dal pieno in BRAL, una lega di bronzo alluminio di eccezionale resistenza in ambiente esterno.

La materia non è un rivestimento: è struttura, è peso, solidità, permanenza. Il colore caldo e naturale del bronzo dialoga con i dettagli neri creando un equilibrio formale che trasforma ogni elemento in un oggetto-scultura.

La famiglia Bronzo è pensata come una insieme di gioielli architettonici: una presenza luminosa discreta, sofisticata, destinata ad inserirsi con eleganza nello spazio e nel tempo.

The Bronze collection is born from the meeting of design, engineering and material culture. Each luminaire is machined from solid BRAL, an aluminium bronze alloy with exceptional resistance in outdoor environments.

The material is not a coating: it is structure, weight, solidity, permanence. The warm, natural tone of bronze interacts with black details to create a formal balance that transforms each piece into a sculptural object.

Bronze family is conceived as a collection of architectural jewels: a discreet, sophisticated luminous presence designed to integrate elegantly into space and time.



La collezione comprende una gamma completa di soluzioni con funzioni diverse, pensata per progettare l'abitazione con un linguaggio coerente. Ogni elemento condivide la stessa identità materica e formale, permettendo di articolare la luce nei vari spazi abitativi mantenendo continuità estetica e progettuale.

The collection includes a complete range of solutions with different functions, designed to shape the home with a coherent design language. Each element shares the same material and formal identity, allowing light to be articulated across living spaces while maintaining aesthetic and design continuity.



BRAL. Materia tecnica, bellezza duratura.

BRAL. Technical material, lasting beauty.

Il cuore della collezione è il BRAL, una lega di bronzo alluminio scelta per applicazioni estreme come turbine navali e componenti meccanici ad alta sollecitazione.

La sua resistenza alla corrosione, alla salsedine e agli sbalzi climatici garantisce una durata superiore negli ambienti outdoor più esigenti. Tornito dal pieno, il materiale mantiene integrità strutturale e precisione assoluta, valorizzando la purezza delle forme.

Il BRAL è inoltre combinato con componenti in alluminio estruso di colore nero, appositamente anodizzato per evitare la creazione di correnti galvaniche responsabili del processo di ossidazione.

Con il tempo, la superficie in BRAL evolve naturalmente senza perdere il suo carattere originario: ogni pezzo acquista una patina unica che racconta il rapporto tra luce, aria e materia.

At the core of the collection is BRAL, an aluminium bronze alloy selected for extreme applications such as marine turbines and high-stress mechanical components.

Its resistance to corrosion, salt exposure and climate variations ensures superior durability in the most demanding outdoor environments. Machined from solid, the material preserves structural integrity and absolute precision, enhancing the purity of its forms.

The BRAL is also combined with black extruded aluminum components, specially anodized to prevent the formation of galvanic currents responsible for the oxidation process.

Over time the BRAL surface evolves naturally without losing its original character: each piece develops a unique patina that reflects the relationship between light, air and matter.





COMFORT LUMINOSO. La luce che rispetta lo sguardo.
VISUAL COMFORT. Light designed to respect vision.

Le ottiche della collezione Bronzo sono progettate per garantire massimo comfort visivo. Le sorgenti arretrate e i filtri honeycomb integrati nell'ottica riducono l'abbagliamento diretto, controllando la distribuzione luminosa con precisione.

Il risultato è una luce morbida, capace di definire architetture e paesaggi senza invadere lo spazio visivo.

La tecnologia rimane nascosta, lasciando emergere solo l'effetto: una presenza luminosa elegante e misurata.

The optics of the Bronze collection are designed to ensure maximum visual comfort. Recessed light sources and integrated honeycomb filters reduce direct glare while precisely controlling light distribution.

The result is a soft light capable of defining architecture and landscapes without invading the visual field.

The technology remains hidden, allowing only the effect to emerge: an elegant and measured luminous presence.

Bronzo soffitto

Bronze Ceiling

SIMES



SOFFITTO DA SUPERFICIE
Ceiling mounted



SOFFITTO DA SEMI-INCASSO
Ceiling semi-recessed mounted

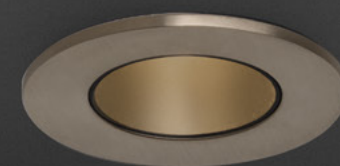


SOFFITTO DA INCASSO
Ceiling recessed mounted

Ø 40

Ø 60

Ø 60



Le versioni downlight da superficie, semi-incasso e incasso permettono un'integrazione totale nell'architettura. Il corpo lampada emerge come un dettaglio raffinato, mentre l'ottica arretrata protegge lo sguardo.

Da spento, l'oscuratore interno appare nero e profondo; quando l'apparecchio si accende, la luce lo colpisce e lo trasforma in un nucleo caldo e bronzato che arricchisce l'estetica del corpo lampada.

Una presenza minima, un dettaglio esclusivo e una resa luminosa versatile, adatta a contesti interni ed esterni.

Surface, semi-recessed, and recessed downlight versions allow total integration with the architecture.

The luminaire body emerges as a refined detail, while the recessed optic shields the eye by acting as a glare control element.

When switched off, the internal optic appears deep black; when the fixture is turned on, light transforms it into a warm, bronze-toned core that enhances the aesthetics of the luminaire body.

A minimal presence, an exclusive detail, and a versatile lighting performance suitable for both indoor and outdoor environments.

Disponibile con fascio 10°, 30° o 60°

Available with 10°, 30° or 60° light beam

Bronzo parete

Bronze Wall mounted

H 230



Ø 40

Disponibile in versione mono o doppia emissione, l'appliche Bronzo disegna la parete con fasci morbidi e controllati. La forma cilindrica ed essenziale ne fa un segno architettonico discreto, capace di valorizzare superfici e volumi anche da spento. Le tre aperture di fascio (10°, 30°, 60°) permettono di assecondare diverse esigenze progettuali.

H 155



Ø 40

Available in single or double emission, the Bronze wall light shapes the wall with soft, controlled beams. Its essential cylindrical form becomes a discreet architectural gesture, enhancing surfaces and volumes even when switched off. The three beam angles (10°, 30°, 60°) allow it to meet a wide range of design needs.

SIMES





Bronzo proiettore

Bronze Spot light

Orientabile e compatto, il proiettore della collezione Bronzo è pensato per valorizzare dettagli architettonici, vegetazione e texture materiche. Lo snodo e la basetta di fissaggio garantiscono stabilità e flessibilità di puntamento. La luce diventa strumento di narrazione spaziale attraverso un oggetto esteticamente essenziale e raffinato.

Adjustable and compact, the spotlight from the Bronze collection is designed to highlight architectural details, vegetation and material textures. The joint and mounting base ensure stability and flexible aiming. Light becomes a tool for spatial storytelling through an object that is aesthetically essential and refined.



Disponibile con fascio 10°, 30° o 60°
Available with 10°, 30° or 60° light beam

SIMES



Bronzo picchetto

Bronze Ground stake



H 650

H 900

Disponibile in versione singola o doppia, il garden stake inserisce punti luce calibrati nel verde. L'altezza variabile consente composizioni dinamiche, creando profondità e ritmo nel paesaggio notturno. Un elemento tecnico che si trasforma in segno poetico.

Available in single or double configuration, the garden stake introduces calibrated light points into the landscape. Variable heights allow dynamic compositions, creating depth and rhythm in the night scene. A technical element that becomes a poetic sign.

SIMES



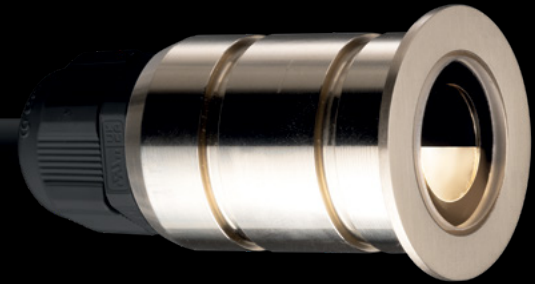


I prodotti della collezione Bronzo si integrano con naturalezza nell'atmosfera mediterranea di questa villa sul mare, dialogando con i toni caldi del paesaggio e dell'architettura.

The products from the Bronze collection blend naturally into the Mediterranean atmosphere of this seaside villa, engaging with the warm tones of the landscape and architecture.

Bronzo segnapasso

Bronze Step light



Ø 40



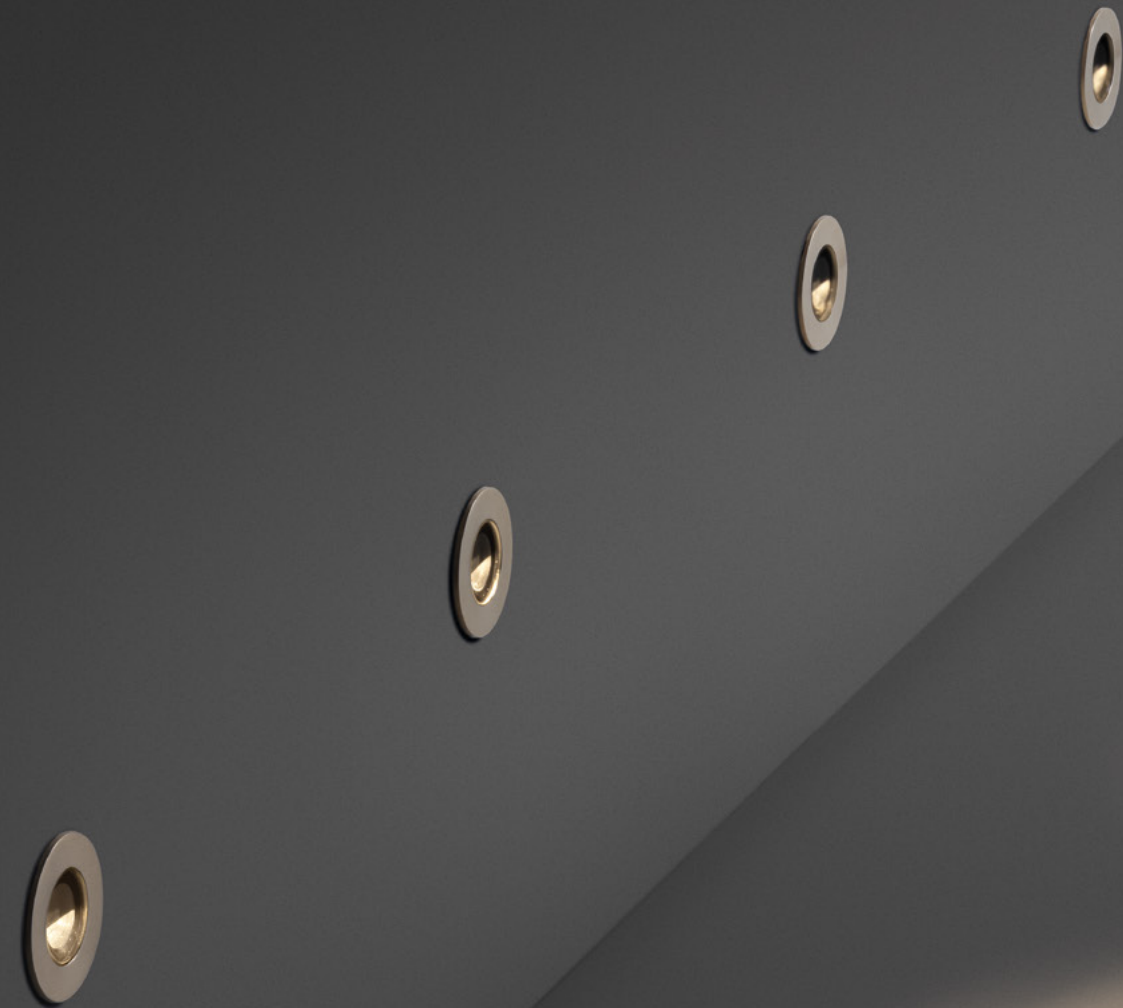
Ø 60



I segnapasso da incasso guidano il passaggio con una luce morbida e schermata, orientata verso il basso. Due diametri permettono soluzioni proporzionate a ogni scala architettonica. Sicurezza e atmosfera convivono in un corpo lampada miniaturizzato ma estremamente funzionale e integrabile sia in interno che in esterno.

Recessed step lights guide the way with a soft, shielded light directed downward. Two diameters allow solutions proportioned to any architectural scale. Safety and atmosphere coexist in a miniaturized yet highly functional fixture that integrates seamlessly in both indoor and outdoor settings.

SIMES



Bronzo interrato

Bronze Inground walkover



Ø 40

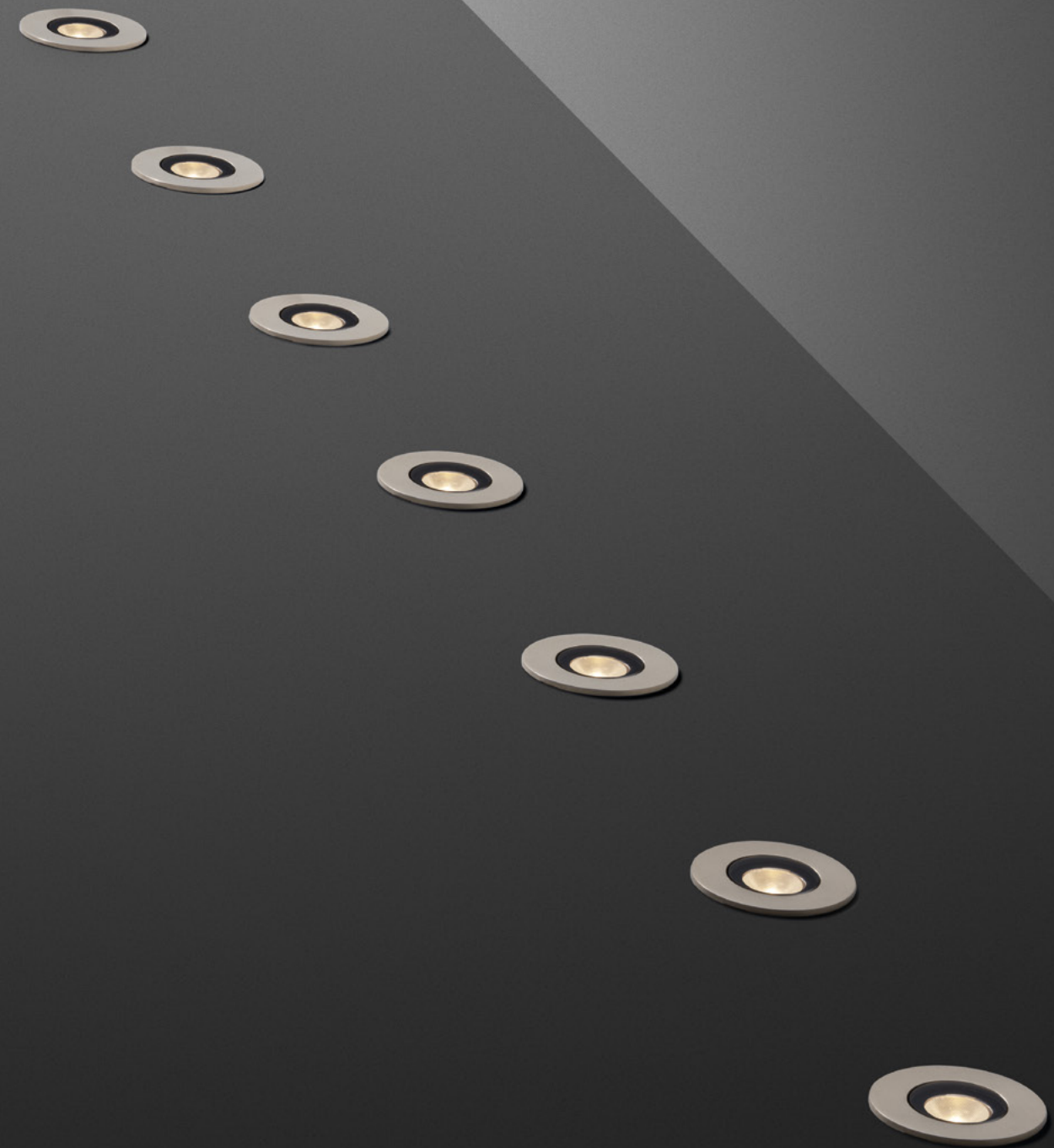
Ø 60

Gli interrati calpestabili interpretano la luce per scandire percorsi o creare raffinati effetti di luce radente sulle superfici verticali e sono disponibili in due dimensioni, e tre diversi tipi di fasci (stretto, medio e diffuso).

Walk-over inground fittings use light to define pathways or create refined grazing effects on vertical surfaces, and are available in two sizes and three beam options (narrow, medium, and wide).



SIMES



BRONZO







Bronze

COMPOSIZIONE DEL CODICE Code composition			
CODICE Code	KELVIN	COLORE Colour	
B.1000	H (2700K)	.38 BRAL	
	W (3000K)		
	N (4000K)		

INFORMAZIONI GENERALI FAMIGLIA General range info			
GRADO DI PROTEZIONE Protection class	CLASSE DI ISOLAMENTO Insulation class	RESISTENZA IMPATTO Mechanical resistance	MATERIALE Material
IP 66	CLASS III	IK 08	BRAL (Bronzo - Alluminio) BRAL (Bronze - Aluminium) Dettagli neri in alluminio estruso anodizzato e verniciato Black details in anodized and painted extruded aluminum







BRONZO SOFFITTO INCASSO COMFORT Ø60 mm

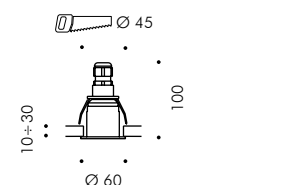     Bronze comfort ceiling recessed Ø60 mm

	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM

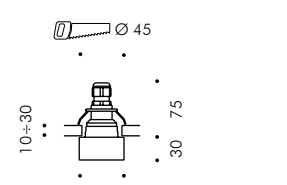     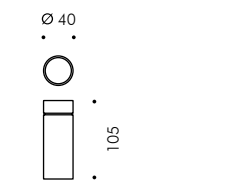
 
 
 

 
BRONZO SOFFITTO SEMI INCASSO COMFORT Ø60 mm

Bronze comfort ceiling semi recessed Ø60 mm

	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM

BRONZO SOFFITTO SUPERFICIE Ø40 mm

Bronze ceiling surface Ø40 mm

	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM

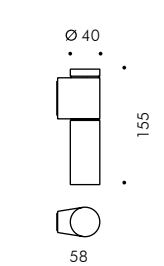
 
 

 

BRONZO

Bronze

SIMES

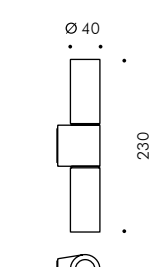
 
 

 
 
BRONZO PARETE MONOEMISSIONE Ø40 mm

Bronze wall monoemission Ø40 mm

	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM

BRONZO PARETE BIEMISSIONE Ø40 mm

Bronze wall biemission Ø40 mm


	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
		H (2700K)	852lm	10.8W	24Vdc	remote	PWM
		W (3000K)	984lm	10.8W	24Vdc	remote	PWM
		N (4000K)	1140lm	10.8W	24Vdc	remote	PWM
		H (2700K)	852lm	10.8W	24Vdc	remote	PWM
		W (3000K)	984lm	10.8W	24Vdc	remote	PWM
		N (4000K)	1140lm	10.8W	24Vdc	remote	PWM
		H (2700K)	852lm	10.8W	24Vdc	remote	PWM
		W (3000K)	984lm	10.8W	24Vdc	remote	PWM
		N (4000K)	1140lm	10.8W	24Vdc	remote	PWM

BRONZO

Bronze

BRONZO PROIETTORE

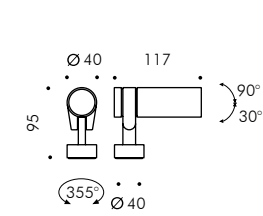
Bronze spot light



CODE	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
B.1100		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
B.1101		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
B.1102		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM

BRONZO PICCHETTO

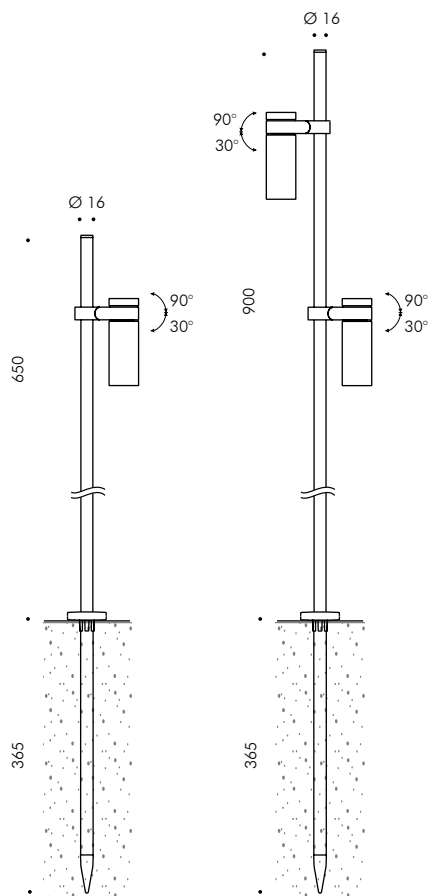Bronze ground stake




CODE	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
B.1110		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
B.1111		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
B.1112		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
CODE	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
B.1120		H (2700K)	852lm	10.8W	24Vdc	remote	PWM
		W (3000K)	984lm	10.8W	24Vdc	remote	PWM
		N (4000K)	1140lm	10.8W	24Vdc	remote	PWM
B.1121		H (2700K)	852lm	10.8W	24Vdc	remote	PWM
		W (3000K)	984lm	10.8W	24Vdc	remote	PWM
		N (4000K)	1140lm	10.8W	24Vdc	remote	PWM
B.1122		H (2700K)	852lm	10.8W	24Vdc	remote	PWM
		W (3000K)	984lm	10.8W	24Vdc	remote	PWM
		N (4000K)	1140lm	10.8W	24Vdc	remote	PWM

BRONZO

Bronze

BRONZO INCASSO PARETE Ø 40mm

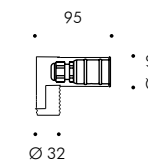
Bronze wall recessed Ø 40mm



CODE	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
B.1070		H (2700K)	240lm	2.2W	24Vdc	remote	PWM
		W (3000K)	260lm	2.2W	24Vdc	remote	PWM
		N (4000K)	320lm	2.2W	24Vdc	remote	PWM

BRONZO INCASSO PARETE Ø 60mm

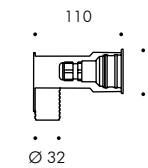
Bronze wall recessed Ø 60mm



CODE	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
B.1080		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM

BRONZO CALPESTABILE DA INCASSO Ø40 mm

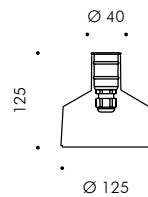
Bronze walk-over Ø40 mm



CODE	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
B.1050		H (2700K)	240lm	2.2W	24Vdc	remote	PWM
		W (3000K)	260lm	2.2W	24Vdc	remote	PWM
		N (4000K)	320lm	2.2W	24Vdc	remote	PWM
B.1051		H (2700K)	240lm	2.2W	24Vdc	remote	PWM
		W (3000K)	260lm	2.2W	24Vdc	remote	PWM
		N (4000K)	320lm	2.2W	24Vdc	remote	PWM
B.1052		H (2700K)	240lm	2.2W	24Vdc	remote	PWM
		W (3000K)	260lm	2.2W	24Vdc	remote	PWM
		N (4000K)	320lm	2.2W	24Vdc	remote	PWM

BRONZO CALPESTABILE DA INCASSO Ø60 mm

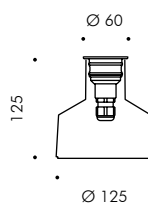Bronze walk-over Ø60 mm



CODE	BEAM	KELVIN	FLUX	POWER	POWER SUPPLY	DRIVER	DIMMING TYPE
B.1060		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
B.1061		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM
B.1062		H (2700K)	426lm	5.4W	24Vdc	remote	PWM
		W (3000K)	492lm	5.4W	24Vdc	remote	PWM
		N (4000K)	570lm	5.4W	24Vdc	remote	PWM

ALIMENTATORI REMOTI A TENSIONE COSTANTE 24Vdc

Remote power supply 24Vdc constant voltage



INDIPENDENTE
Independent

ACCESSORY	IP	POWER	POWER SUPPLY	DIMMING TYPE
S.3400	IP20	10W	24Vdc	on-off
S.2430	IP20	16W	24Vdc	on-off
S.2400	IP20	35W	24Vdc	on-off
S.2401	IP20	60W	24Vdc	on-off
S.2403	IP20	100W	24Vdc	on-off
S.3425	IP54	8W	24Vdc	on-off
S.2407	IP67	14,4W	24Vdc	on-off
S.2433	IP67	36W	24Vdc	on-off
S.2405	IP67	60W	24Vdc	on-off
S.2406	IP67	90W	24Vdc	on-off
S.2445	IP67	120W	24Vdc	on-off
S.2446	IP67	360W	24Vdc	on-off

BOX PROTETTO IP
IP rated Box

ACCESSORY	IP	POWER	POWER SUPPLY	DIMMING TYPE
S.3401	IP55	10W	24Vdc	on-off
S.2435	IP67	16W	24Vdc	on-off
S.2402	IP55	60W	24Vdc	on-off
S.2404	IP55	90W	24Vdc	on-off
S.3664	IP65	35W	24Vdc	on-off
S.3665	IP65	90W	24Vdc	on-off



INDIPENDENTE
Independent

ACCESSORY	IP	POWER	POWER SUPPLY	DIMMING TYPE
S.3426	IP20	16W	24Vdc	DALI2
S.2441	IP20	24W	24Vdc	DALI, PUSH DIM, 0-10V
S.2419	IP20	35W	24Vdc	DALI, PUSH DIM, 0-10V
S.2429	IP20	60W	24Vdc	DALI, PUSH DIM, 0-10V
S.2424	IP20	60W	24Vdc	PUSH DIM, 0-10V
S.2442	IP20	75W	24Vdc	DALI2, PUSH DIM, 0-10V
S.2449	IP20	100W	24Vdc	DALI2, PUSH DIM, 0-10V
S.2411	IP68	15W	24Vdc	0-10V, 1-10V
S.2427	IP67	60W	24Vdc	1-10V
S.2428	IP67	90W	24Vdc	1-10V
S.2415	IP67	24W	24Vdc	DALI
S.2416	IP67	75W	24Vdc	DALI
S.2426	IP67	120W	24Vdc	DALI2
S.2419	IP67	36W	24Vdc	DALI2
S.2429	IP67	75W	24Vdc	DALI2
S.2449	IP67	100W	24Vdc	DALI2
S.2447	IP67	200W	24Vdc	DALI2

BOX PROTETTO IP
IP rated Box

ACCESSORY	IP	POWER	POWER SUPPLY	DIMMING TYPE
S.2438	IP67	16W	24Vdc	DALI2
S.2439	IP67	20W	24Vdc	PUSH DIM, 1-10V
S.2423	IP55	60W	24Vdc	DALI2, PUSH DIM, 1-10V
S.2425	IP55	90W	24Vdc	DALI2, PUSH DIM, 1-10V

Stampato presso
Euroteam Srl Brescia - Italia
www.euroteam.eu

Printed by
Euroteam Srl Brescia - Italy
www.euroteam.eu



S I M E S

Il presente catalogo non può essere riprodotto neppure parzialmente. Tutti i diritti sono riservati.

Le fotografie, la descrizione degli apparecchi, le quote, le dimensioni ed i valori fotometrici menzionati in questo catalogo sono a titolo indicativo e non costituiscono alcun impegno per la nostra società, che si riserva di apportare, senza preavviso, tutte le modifiche che riterrà opportune. I dati tecnici presenti in questo catalogo sono aggiornati alla data di stampa (Febbraio 2026). Consultare le schede tecniche e le istruzioni di montaggio presenti sul sito web per avere i dati tecnici aggiornati.

Le immagini di questo catalogo sono state in parte create con l'ausilio di strumenti di AI generativa e sottoposti ad una elaborazione e controllo umano finale per qualità ed accuratezza.

I prodotti presenti in questo catalogo sono REGISTRATI.

The present catalogue can not be reproduced even partially. All rights reserved.

Due to continual luminaire development and improvement, any photographs, luminaire descriptions, measurements, illustrations, drawings and specifications in this catalogue may be approximations, and the company is not liable. We reserve the right to change specifications without prior notice. The technical data contained in this catalogue is update up to the date of print (February 2026). For updated data, see technical sheets and installing instructions available on the website.

The images in this catalog have been partially created with the help of generative AI tools and subjected to final human processing and review for quality and accuracy.

Luminaires in this catalogue are REGISTERED.

www.simes.com

SIMES

luce per l'architettura

SIMES S.p.A. Via G. Pastore 2/4 - 25040 Corte Franca (BS) - ITALY
(+39) 030 9860411 simes@simes.it
www.simes.com

