













H U N T E R

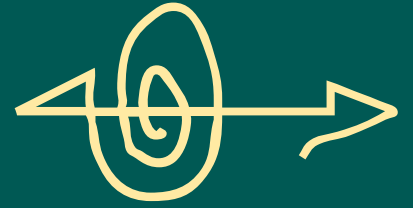


HUNTER PANELS **TAPERED POLYISO PROFILES**

TAPERED PANELS 48" X 48"				
	Panel	Thickness	Average Thickness	Pieces Per Bundle
1/16" Slope	1	0.5" - 0.75"	0.625"	76
	2	0.75" - 1.0"	0.875"	54
	3	1.0" - 1.25"	1.125"	42
	4	1.25" - 1.5"	1.375"	34
	5	1.5" - 1.75"	1.625"	28
	6	1.75" - 2.0"	1.875"	24
	7	2.0" - 2.25"	2.125"	22
	8	2.25" - 2.5"	2.375"	20
1/8" Slope	AA	0.5" - 1.0"	0.75"	64
	A	1.0" - 1.5"	1.25"	38
	B	1.5" - 2.0"	1.75"	26
	C	2.0" - 2.5"	2.25"	20
	D	2.5" - 3.0"	2.75"	16
	E	3.0" - 3.5"	3.25"	14
	F	3.5" - 4.0"	375"	12
	FF	4.0" - 4.5"	4.25"	10
3/16" Slope	JJ	0.5" - 1.25"	0.875"	54
	KK	1.25" - 2.0"	1.625"	28
	LL	2.0" - 2.75"	2.375"	20
	MM	2.75" - 3.5"	3.125"	14
	J	1.0" - 1.75"	1.375"	34
	K	1.75" - 2.5"	2.125"	22
	L	2.5" - 3.25"	2.875"	16
	M	3.25" - 4.0"	3.625"	12
1/4" Slope	X	0.5" - 1.5"	1.0"	48
	Y	1.5" - 2.5"	2.0"	24
	Z	2.5" - 3.5"	3.0"	16
	ZZ	3.5" - 4.5"	4.0"	12
	G	1.0" - 2.0"	1.5"	32
	H	2.0" - 3.0"	2.5"	18
	I	3.0" - 4.0"	3.5"	12
3/8"	SS	0.5" - 2.0"	1.25"	38
	TT	2.0" - 3.5"	2.75"	16
	S	1.0" - 2.5"	1.75"	26
1/2"	Q	0.5" - 2.5"	1.5"	32
	QQ	2.5" - 4.5"	3.5"	12
	XX	1.0" - 3.0"	2.0"	24

Highlighted panels are used in extended panel tapered systems.

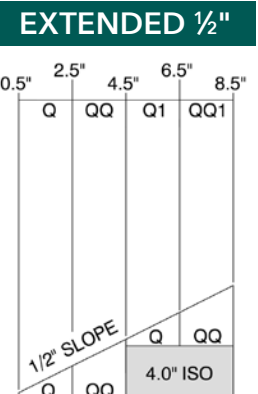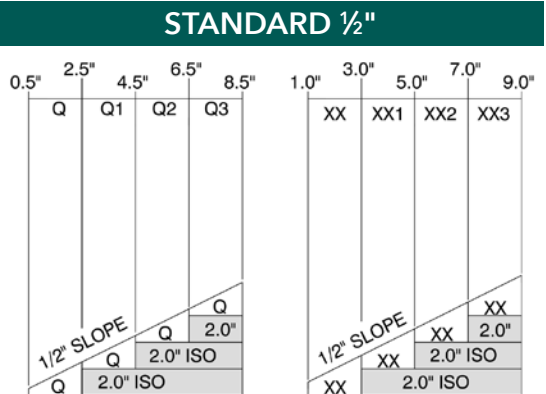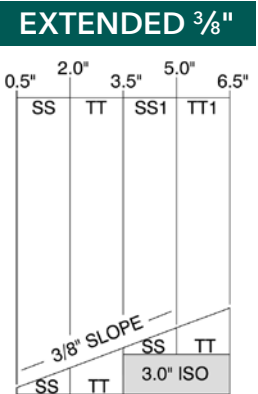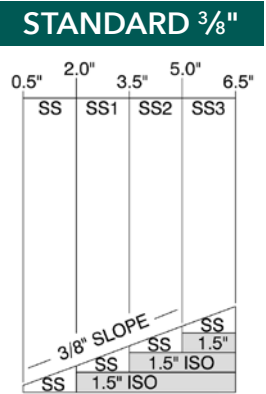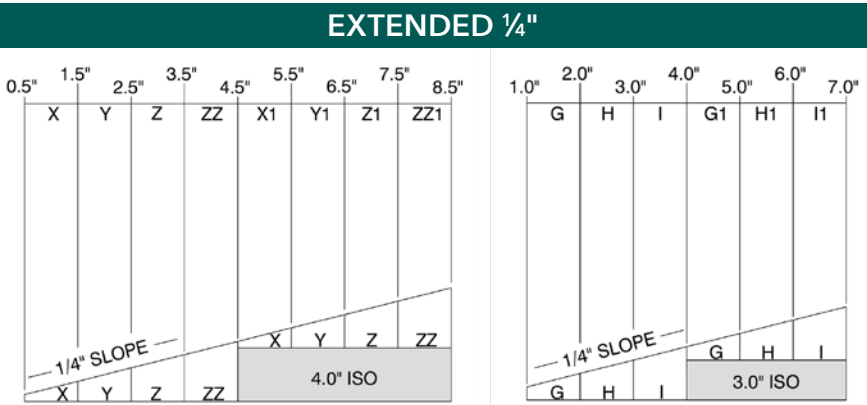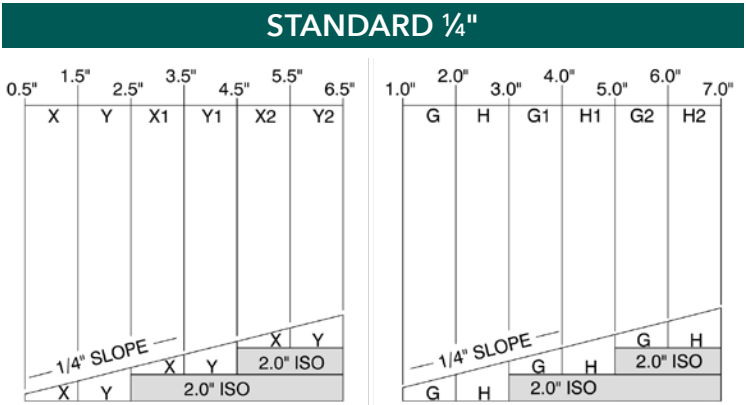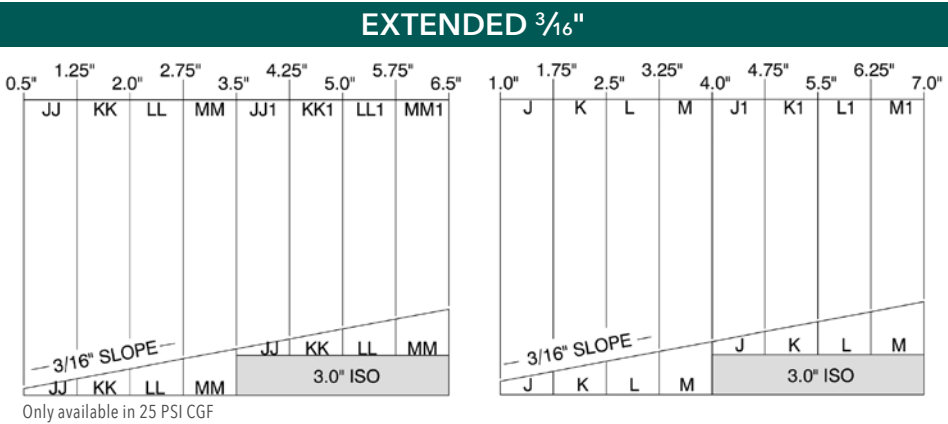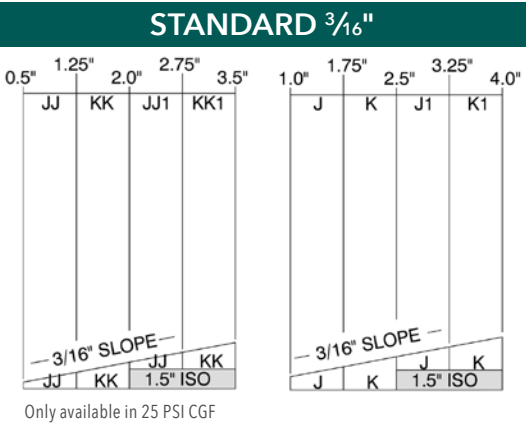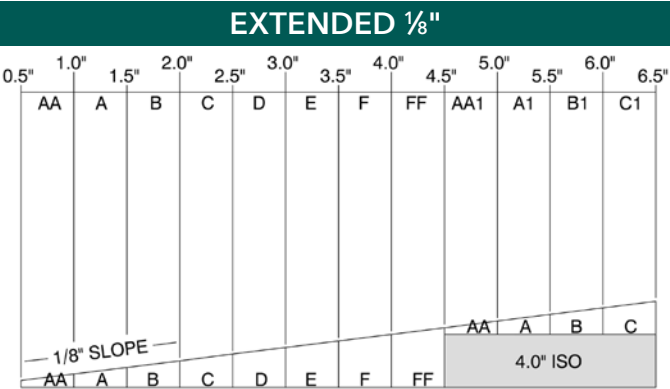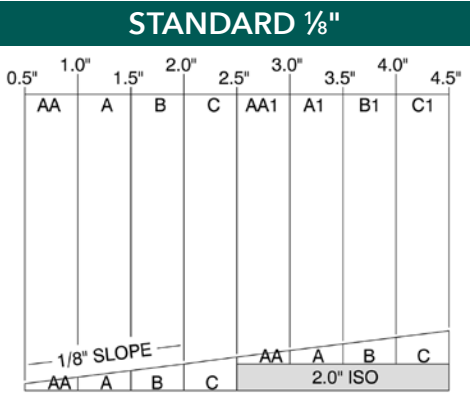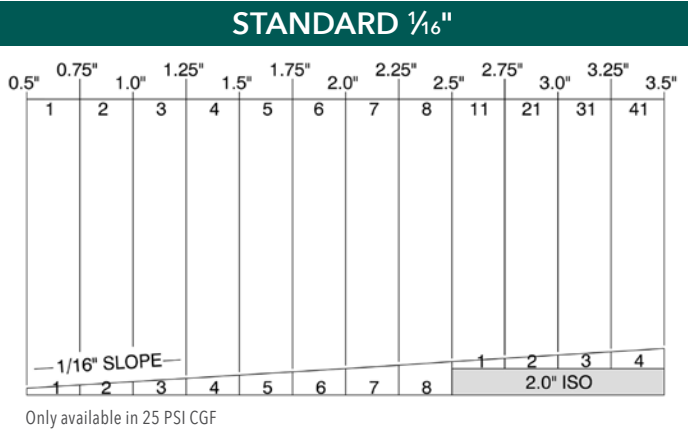

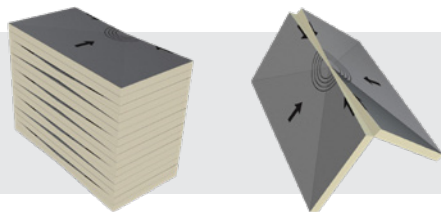


HINGED TARGET SUMP

8' X 8' HINGED DRAIN SUMP

- Manufactured with Tapered H-Shield and Tapered H-Shield CG, 25 PSI
- 8' x 8' pre-assembled sump
- Ships folded 4' x 8'
- Perimeter edge thicknesses 1.5", 2", 2.5", 3"
- Pre-cut Hinged Target Sumps save 50% in material and waste costs over field fabricated sumps

HINGED TARGET SUMP

Slope	Panel	Minimum Thickness	Maximum Thickness	Pieces Per Package
1/4" slope	X	0.5	1.5	14
	G	1.0	2.0	10
	Y	1.5	2.5	8
1/2" slope	Q	0.5	2.5	8
	XX	1.0	3.0	6
3/8" slope	SS	0.5	2.0	10

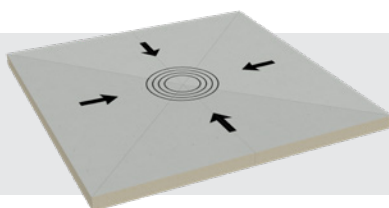

4' X 4' TARGET SUMP

4' X 4' DRAIN SUMP

- Manufactured with Tapered H-Shield CG, 25 PSI
- 4' x 4' pre-assembled sump
- Ships flat 4' x 4'
- Pre-cut 4' x 4' sumps save 74% in material and waste costs over field fabricated sumps



TARGET SUMP

Slope	Panel	Minimum Thickness	Maximum Thickness	Pieces Per Package
1/2" slope	Q1	0.5	1.5	30
	Q2	1.5	2.5	18
	XX1	1.0	2.0	22
	XX2	2.0	3.0	15

PRE-CUT TAPERED HIPS & VALLEYS

- Manufactured with Tapered H-Shield and Tapered H-Shield CG, 20 or 25 PSI
- Flexibility in design and size: custom designed to meet your job site requirements including slope, minimum and maximum thicknesses. Available in 1/8", 1/4", and 1/2" Panels

- Individually packaged, pre-assembled and labeled
- Pre-cut hips and valleys save 50% in material and waste costs over field-fabricated hips and valleys

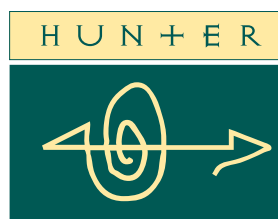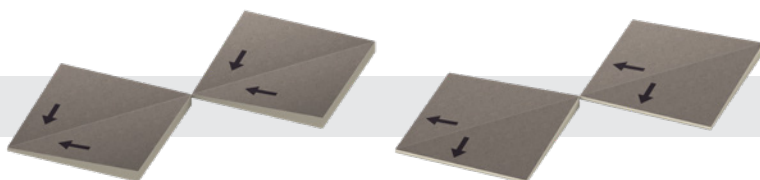

15 Franklin Street ■ Portland, Maine 04101 ■ 888.746.1114 ■ info@hpanels.com ■ www.hunterpanels.com