

peerless-AV[®]

Xtreme[™]
High Bright
Outdoor Displays



Download our app today!




Own Your
Dream Home

We'll help you to buy your dream home!





Gate 1 Departures					
Flight	Destination	Time	Flight	Destination	Time
WS 001	Washington	12:20	MI 002	Miami	04:20
HK 002	Hong Kong	14:00	QF 011	Queensland	06:00
PS 015	Paris	14:40	PS 015	Paris	06:20
LN 044	London	15:30	QF 044	Queensland	06:30
BC 004	Bangkok	16:10	AT 000	Atlanta	06:35
MS 014	Moscow	17:05	MS 000	Moscow	06:45
NY 100	New York	18:05	AM 100	Atlanta	06:50

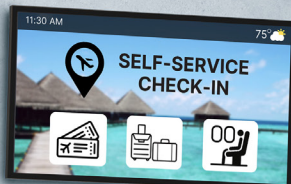

Xtreme™ High Bright Outdoor Displays


UNMATCHED DISPLAY CAPABILITIES

There has never been an outdoor daylight readable display built to withstand the harsh outdoor elements like the Peerless-AV® Xtreme™ High Bright.



WEATHERPROOF TECHNOLOGY IP66

Fully-sealed & fully protects against water, dust, moisture & insects

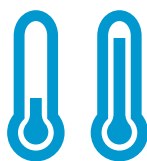

TEMPERATURE RANGE -35°C to 60°C

Designed to thrive outside year-round, without worry of extreme hot or cold temperature waves



RESILIENT IK10 RATED COVER GLASS

Anti-reflective, impact resistant safety glass fully protects the screen against vandalism & debris




TRULY SUNLIGHT READABLE

Optically bonded to increase the perceived contrast ratio and cut down on glare




MANAGED SERVICES COMPATIBLE

Supports remote & local monitoring, allowing the ability to view real-time diagnostics & measure proof of performance

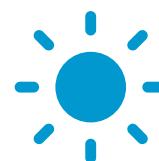

HIGH BRIGHT OUTPUT 2,500 NITS

Ambient Light Sensor automatically adjusts brightness, optimising the display's power consumption

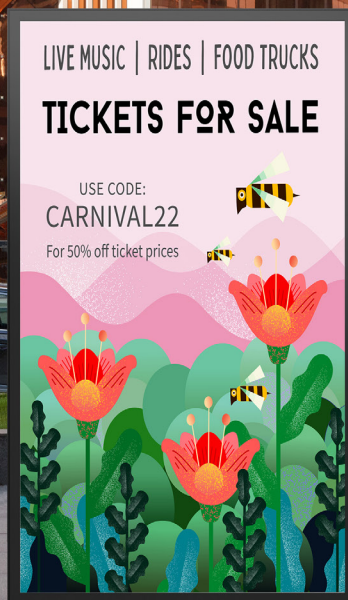

Offering top-of-the-line outdoor video quality, along with the durability & longevity backed by a two-year warranty, Peerless-AV Xtreme High Bright Outdoor Displays will take your business to the next level.



XHB554-EUK (55")

Resolution	Brightness	Contrast Ratio	Viewing Angle	Refresh Rate
HD	2,500cd/m ²	2000:1	178° Vertical/Horizontal	60Hz
IP Rating	Operating Temperature	Inputs	Tempered Cover Glass	Usage
IP66	-35°C to 60°C	HDMI, DisplayPort, USB, RS232, LAN, IR Extender, ALS Extender	IK10	24/7

Transform Your Outdoor Space with All-in-One Solutions

The Xtreme™ High Bright Outdoor Display can be much more than a standalone unit – Peerless-AV® also designs & manufactures stylish, fully integrated kiosk solutions.



SMART CITY KIOSKS

Upgrade your current signage with a brand new Peerless-AV® Smart City Kiosk. This next generation Smart City Kiosk will allow you to replace dynamic, digital content quickly, easily, and remotely, drawing in more engagement than your previous static signage



model numbers:

**KOP55XHB-(S)-EUK, KOP55XHB-(S)A-EUK
KOP55XHB2-(S)-EUK, KOP55XHB2-(S)A-EUK**

- Single and dual sided options available
- Includes 55" Xtreme™ High Bright Outdoor Display
- Available in black or silver and with or without speakers to ensure your product needs are met
- IP55 rated media cabinet
- All stainless steel and aluminium body combined with an outdoor rated paint finish to provide the ultimate in corrosion resistance
- Wind tested up to 135 mph
- Sleek yet rugged design protects the display, while also providing ample space for component storage

Visit peerless-av.com to learn more about Peerless-AV's complete line of outdoor solutions.



OUTDOOR DIGITAL SIGNAGE BOARDS

This all-weather rated, outdoor unit offers a low operating cost, thin profile, modular design, and an easy, two-man installation process.



model numbers:

KOF555-1-EUK, KOF555-2-EUK, KOF555-3-EUK

- Available as a single, dual or triple display unit, to ensure your product needs are met
- Displays can be replaced or repaired without disturbing the adjacent units
- Sleek and stylish, yet rugged enough to be installed in any outdoor application for 24/7 use
- Elegant, minimalistic design protects displays and internal equipment, while enhancing the drive-thru aesthetic

Visit peerless-av.com to learn more about Peerless-AV's complete line of outdoor solutions.



IR TOUCH OVERLAY

Effortlessly upgrade your Smart City Kiosk or stand alone Xtreme display into an interactive user experience with the IR Touch Overlay accessory.



model number:
IRTO55-XHB4

- 10 points simultaneous touch allows for flexibility in content selection
- All Weather Rated IP65
- Operating Temperature Range: -10°C to 40°C
- Easy setup
- HID-compliant
- Exceptional response time $\leq 15\text{ms}$
- Can be installed in either Landscape or Portrait orientation
- Compatible with: XHB554-EUK, KOP55-XHB-EUK and KOP55-XHB2-EUK

Visit peerless-av.com to learn more about Peerless-AV's complete line of outdoor solutions.

OUTDOOR SOLUTIONS


Peerless-AV® is a one-stop-shop for all your professional outdoor AV needs.



DISPLAY MOUNTS

Mount your display outdoors with confidence using our corrosion resistant E-Coat finish and stainless steel hardware.

Visit peerless-AV.com for mount compatibility per display size.

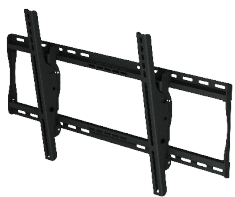

Outdoor Universal Tilt Wall Mount. For 32" to 75" Landscape Displays.

model number:
EPT650



Outdoor Flat Wall Mount, Landscape for the XHB754-EUK.

model numbers:
ESF675




Outdoor Universal Flat Wall Mount, for 42" to 80" Portrait Displays.

model numbers:
ESF655P




Outdoor Universal Tilt Wall Mount, for 42" to 80" Portrait Displays.

model numbers:
EST655P

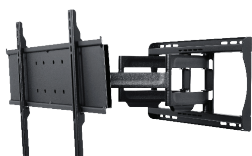

Outdoor Articulating Wall Mount. For 42" to 75" Landscape Displays.

model number:
EPA762PU

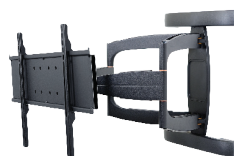

Outdoor Articulating Wall Mount, Landscape for the XHB554-EUK.

model number:
ESA763PU



For over 80 years, passion and innovation continue to drive Peerless-AV forward.

We proudly design and manufacture the highest quality products, including outdoor displays and TVs, dvLED and LCD video wall systems, complete integrated kiosks, professional carts and stands, and more. Whether a full-scale global deployment or high volume custom project,

Peerless-AV develops meaningful relationships and delivers world-class service.

In partnership with Peerless-AV, you are trusting an award-winning team of experts who will support your business every step of the way. For more information, visit peerless-av.com.



peerless-av.com



+44 (0) 1923 200100