

## SEAMLESS KITTED UNIVERSAL




2024 Winner





# SEAMLESS KITTED UNIVERSAL

Ready to revolutionise latching dvLED display installations, the new DS-LEDUNV is truly universal, unlike any other mount in the industry. Speed to market and a faster, effortless install make this the mount of choice for any wow-factor flat-to-wall dvLED project.

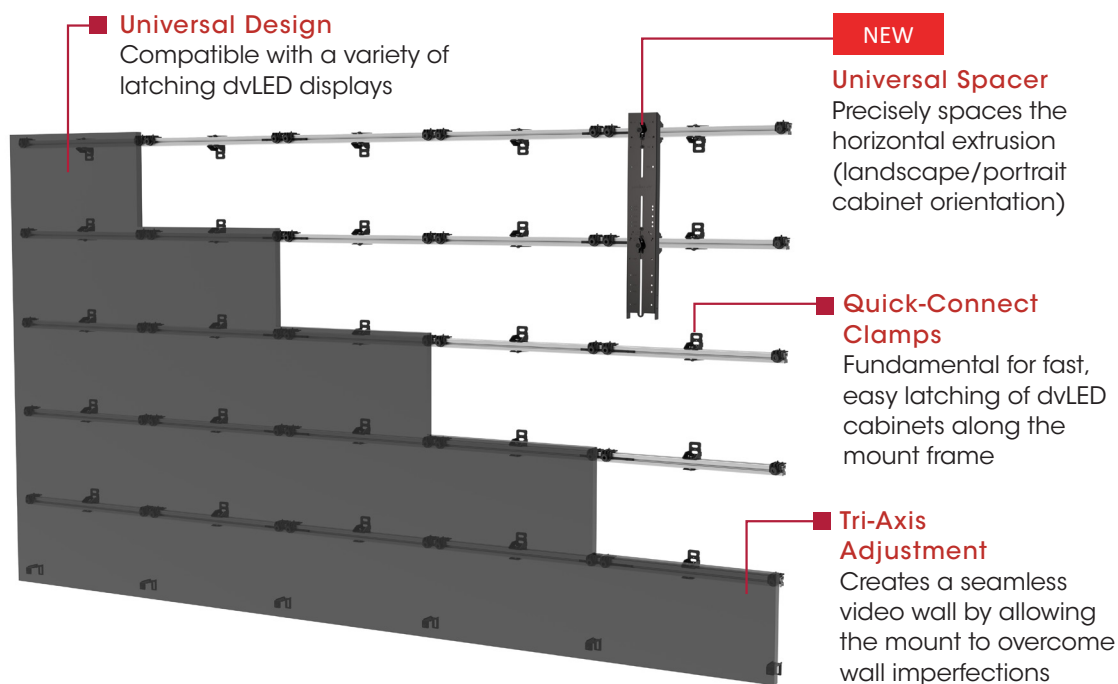

## Technical Specifications

Model	dvLED cabinet width	Load Capacity	Size (w x h x d)	Contents
DS-LEDUNV610-4x4	up to 610mm wide	23.6kg (52lb) per display	2,438 x VARIES x 70-89mm	Universal Spacer, Wall Plate, Extrusion & Joiners, Quick-Connect Adaptor Clamps, Standoff and Mounting Hardware
DS-LEDUNV610-5x5	up to 610mm wide		3,048 x VARIES x 70-89mm	
DS-LEDUNV610-6x6	up to 610mm wide		3,658 x VARIES x 70-89mm	
DS-LEDUNV610-8x8	up to 610mm wide		4,877 x VARIES x 70-89mm	
DS-LEDUNV960-3x3	up to 960mm wide		2,880 x VARIES x 70-89mm	
DS-LEDUNV960-4x4	up to 960mm wide		3,840 x VARIES x 70-89mm	
DS-LEDUNV960-5x5	up to 960mm wide		4,800 x VARIES x 70-89mm	
DS-LEDUNV1220-3x3	up to 1220mm wide		3,658 x VARIES x 70-89mm	
DS-LEDUNV1220-4x4	up to 1220mm wide		4,877 x VARIES x 70-89mm	





## SEAMLESS KITTED UNIVERSAL

NEW

The 1:1 DS-LEDUNV models are available for displays up to 610mm, 960mm and 1220mm wide and are the first to include a universal hardware pack, compatible with the majority of latching dvLED cabinets. This allows for increased consistency in terms of ordering and shipping, whether the configuration is 4x4, 6x6, 8x8, or any other combination and irregular layout.

The simple 1:1 nature of the product (1 mount to 1 cabinet) makes it easier to specify into projects, without the need to know the display make, model and configuration. Being a universal solution also means that once trained, an installer can mount any compatible display accurately and efficiently.

The unique Universal Spacer (sold separately for 1:1 products) is reusable, and has set pin height locations for common cabinet sizes from 240mm up to 1000mm, eliminating the need for dedicated wall templates and enabling faster integration by precisely aligning the horizontal extrusion for either landscape or portrait cabinet configuration. The spacer's built-in caliper feature can be used to measure the display height for uncommon cabinet sizes and set the spacing accordingly.


- **1 to 1 solution** - for ease of quoting & configuration
- **3 size options** - accommodates majority of dvLED brands / models
- **Custom spacer** - precisely positions horizontal extrusion for a seamless install
- **Compact packaging** - reduces shipping costs and onsite handling issues
- **Precision joiners** - ensures accurate alignment between units




DS-LEDUNVSPACER



DS-LEDUNV610 / 960

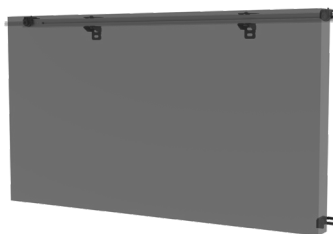

DS-LEDUNV1220

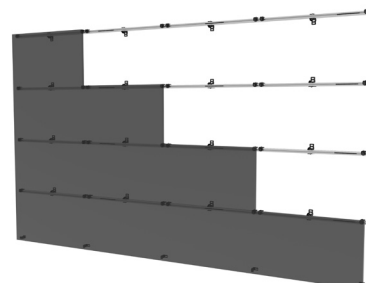

DS-LEDUNV610-4x4

### Technical Specifications

Model	dvLED cabinet width	Load Capacity	Size (w x h x d)	Contents
DS-LEDUNV610	Up to 610mm	23.6kg per display	610 x 81 x 70-89mm	Wall Plate, Extrusion & Joiners, Quick-Connect Adaptor Clamps, Standoff and Mounting Hardware
DS-LEDUNV960	Up to 960mm		960 x 81 x 70-89mm	
DS-LEDUNV1220	Up to 1220mm		1220 x 81 x 70-89mm	
DS-LEDUNVSPACER	N/A	N/A	1187 x 104 x 81mm	Universal Spacer (Pair), Tools
DS-LEDUNVECC3X3	End caps for 30x30mm extrusion (Pair)			
DS-LEDUNVWP	Adjustable Wall Plate kit (For 610 & 960 1:1 models in single column application)			



# SEAMLESS KITTED UNIVERSAL

## Unique Key Features

### Unique, Re-useable Universal Spacer

Precisely spaces the horizontal extrusion for landscape or portrait cabinet orientation with set pin height locations, meaning installers no longer need dedicated set height wall templates. Includes a built-in calliper for measuring and spacing uncommon cabinet sizes and can be re-used for other installs.

### Scalable and Reconfigurable

The DS-LEDUNV models are available in 610mm wide, 960mm wide and 1220mm sizes. The kitted design makes it far more reconfigurable, should project requirements change, and its universality means that once installs team are trained, they can install any compatible display accurately and efficiently.

### Tri-Axis Adjustment

Depth adjustment is important to achieve a perfectly flat video wall surface. The DS-LEDUNV offers an industry-leading 20mm (+/- 10mm) of travel. The X & Y axis fine tuning determines the horizontal and vertical movement of the cabinets so they can be adjusted to latch softly ensuring no pixel damage.

### Unique Quick-Connect Clamps

The unique quick-connect clamps make the DS-LEDUNV truly universal, saving valuable time and costs versus dedicated mounts. Fundamental for fast, easy latching of dvLED cabinets along the mount frame, the clamps also include height adjustment to make the install process straightforward, from start to finish.

### Optional Trim Kit Accessory

Perfect your next dvLED video wall installation by adding the DS-LEDTK SEAMLESS Universal Trim Kit.

### Leaner, Greener Packaging

Condensed packaging by up to 50% lowers environmental impact while reducing shipping costs and warehouse space when storing.

NEW







## SEAMLESS KITTED UNIVERSAL

Compatible dvLED Display Brands\*

**Abysen**

**AOTO**

**BARCO**

**BOE**

**CHKISTIE**

**dahua**  
TECHNOLOGY

**DAKTRONICS**

**FABULUX LED**

**HIKVISION**

**Hisense**

**INFILED**

**Jupiter**

**JUST VIDEO WALLS**

**LEYARD**  
**PLANAR**

**LG** Business Solutions

**LinsnLED**

**MAXHUB**

**PHILIPS**

**QST**  
Quality Systems Technology

**SAMSUNG**

**SHARP / NEC**

**SNA DISPLAYS**

**SONY**

**Unilumin**

**VESTEL**

\*Please visit the product webpage, or contact a Peerless-AV® Sales Representative, for the current list of compatible latching dvLED display models.

For more information, visit [peerless-av.com/SEAMLESS](http://peerless-av.com/SEAMLESS)

Also available...

## SEAMLESS KITTED<sup>+</sup>


### Adaptable range of dvLED Mounting Substructures

For any application where mounting directly to a wall is not an option, the KittED+ Series offers a choice of substructure categories (Free Standing / Mobile Trolley / Bolt Down / Floor-to-Wall / Floor-to-Ceiling) to safely support the total load of a dvLED video wall or all-in-one display.


DS-LEDKMT Models - Mobile Trolley




DS-LEDKFS Models - Free Standing

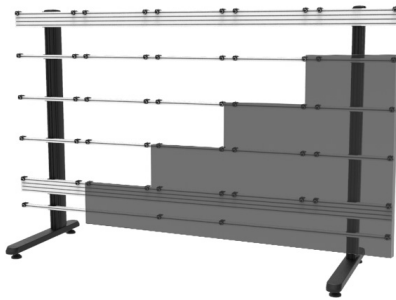


DS-LEDKBD Models - Bolt Down

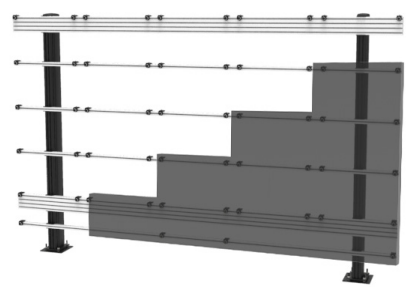

DS-LEDKFW Models - Floor to Wall

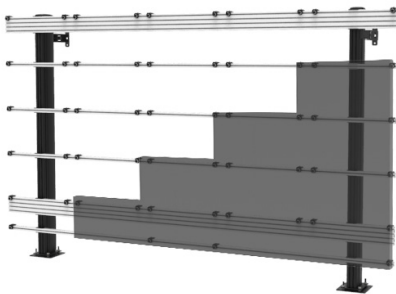

DS-LEDKFC Models - Floor to Ceiling

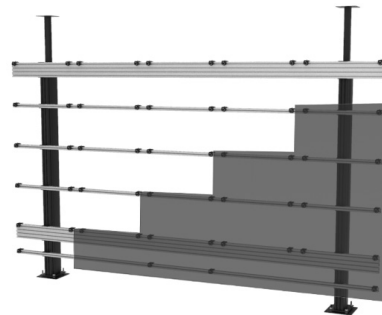

+44 (0)1923 200 100  
[sales@peerless-av.co.uk](mailto:sales@peerless-av.co.uk)  
[www.peerless-av.com](http://www.peerless-av.com)

**peerless-AV<sup>®</sup>**  
*Driving Technology Through Innovation*

© 2024 Peerless Industries, Inc. All rights reserved. E&OE

Peerless-AV constantly strive to develop new products & improve existing ones. We therefore reserve the right to change or revise product designs, specifications and model numbers without notice. All brands, product names and taglines are trademarks or registered trademarks of their respective owners.