

Featured Product: Dual Line Post

The Industry Leading Stanchion with Two Belts for Added Protection

Your search for the 'right post' ends here. The tried and true **RETRACTA-BELT®** is found all over the world in airports, casinos, universities, museums, hospitals, theme parks, stadiums and major retail chains.

Dual Line posts are **ADA-Compliant**, prevent line-ducking, and provide added protection for small children waiting in line. **RETRACTA-BELT®** stanchions are proudly **manufactured in the USA since 1992** and have proven for decades to be the safest and most durable post on the market.



Strong and slow rotary damper brake: with E-Z Back® Technology creates the safest and quietest post on the market.

Two piece construction: allows easy on-site repair, unlike other manufacturer's dual line posts. Avoids the costly expense of shipping the unit to the manufacturer.

Heavy gauge construction: combined with proven designs, strict quality standards and premium materials for the most durable post on the market.

Built-in rubber floor protectors: ensure long lasting scuff protection.

Thick and durable 10' belt: we can Dye-Sub or Silk Screen nearly any design.

Universal belt end:

- ▶ Works with nearly every stanchion.
- ▶ Locks to prevent accidental release.

Featuring Exclusive **EVERstraight®** Technology



- ▶ **Large diameter threaded steel base connection ensures the post remains straight for its lifetime.**
- ▶ Heavy cast iron base keeps the post in place.

Additional Features


- ▶ **Ten year warranty.**
- ▶ **Built-in sign attachment:** so there's no need for costly adapters.
- ▶ **Available in four heavy gauge materials:** and hundreds of finishes.
- ▶ **Easy assembly:** no tools required.

Options & Upgrades

- ▶ Scuff resistant black ABS or matching metal base cover.
- ▶ 30 lbs. base for added stability.
- ▶ **RETRACTA-WHEEL** for easy transportation.
- ▶ Knocked-Down shipping.
- ▶ Weather-Protection.
- ▶ **MINI-SOCKET, MAGNETIC, FIXED or REMOVABLE** post mounts.

Post-N-Panel Systems

Post-N-Panels easily integrate with Dual Line posts, providing a secure structural barrier and a signage display. See Post-N-Panel Systems flyer for details.

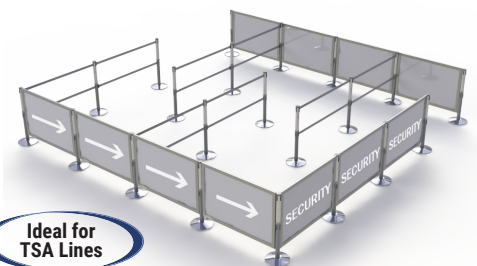

Ideal for TSA Lines

Specs	
Post Material	Alum, Plastic, Steel, Stainless Steel or Brass
Base Cover Material	ABS, Steel, Stainless Steel or Brass
Baseweight Material	18 lbs. Cast Iron w/ Floor Protectors
Post Diameter	2.5"
Base Diameter	14"
Overall Post Height	40"
Overall Weight	24 - 27 lbs.
Belt Heights	19.75" and 37"



To Order Specify:

300D MODEL # **SASS** FINISH **LB** BELT COLOR

Stock Finishes

	Black Aluminum BA ☂		Black Plastic PSB* ☂
	Yellow Aluminum YA ☂		Yellow Plastic PYW* ☂
	Polished Aluminum PA*/PAPC** ☂		Red Plastic PRD* ☂
	Satin Aluminum SA*/SASS** ☂		White Plastic PWH* ☂
	Satin Stainless Steel SS ☂		

☂ Can be weatherproofed for exterior use
 * 301D Models
 ** 300D Models

Matching metal base cover is not available on BA, YA, PYW, PRD, PSB, or PWH.
 A scuff resistant black ABS base cover is standard on these finishes.

Specialty Finishes

Class 1: Powder Coat over Steel Posts

	Smooth Black SB		Green GN
	Wrinkle Black WB		Blue BL
	Charcoal CH		Brown BN
	Grey GY		Beige BG
	White WH		Silver Vein SV
	Red RD		Gold Vein GV



Class 2: Plating over Steel

	Polished Chrome Plated PC
	Satin Chrome Plated SC
	Polished Brass Plated PB2
	Satin Brass Plated SB2
	Statuary Bronze Plated SBZ2

Class 3: Solid Brass

	Polished Brass w/ Clear Coat PB3 ☂
	Satin Brass w/ Clear Coat SB3 ☂
	Statuary Bronze w/ Clear Coat SBZ3 ☂

Class 4*:

Wood, Marble, Camouflage, etc.



- Class 1 specialty finishes require a minimum order of 5 pieces and a 2-3 week lead time.
- Class 2 & 3 specialty finishes require a minimum order of 15 pieces and a 5-7 week lead time.
- Class 4 specialty finishes are sublimated order coat over steel. Various patterns such as wood grain, marble and camouflage are available. Call for details.

Call if quicker delivery is needed.

☂ Can be weatherproofed for exterior use

Standard Belt Options

	Black BK		Green GN
	Grey GR		Dark Green DG
	White WH		Light Blue LB
	Brown BN		Blue BL
	Maroon MN		Dark Blue DB
	Red RD		Purple PL
	Orange OR		Fluorescent Yellow FY
	Yellow YW		Fluorescent Orange FO
			Black/White Stripe BW

Specialty Belt Options (Double Sided)

	Black/Yellow Diagonal BYD
	Red/White Diagonal RWD
	Magenta/Yellow Diagonal MYD
	This Lane Closed TLC
	Caution-Do Not Enter CAU
	Danger-Keep Out DKO
	No Entry NE
	Authorized Access Only AAO

Custom Dye-Sub Belt Samples



Dye Sub is not intended for prolonged exposure to UV.

Due to printing limitations, colors shown may not represent actual product colors. Please call for samples if required.