

## CIRCLE PORTAL OPTIONAL FB4 & RC4

**OVERALL DIMENSIONS** Ø x H (mm)  
 1050 x 2400

**WIDTH OF PASSAGE** (mm)  
 900

**FLOOR THICKNESS** (mm)  
 Standard Base 65  
 Slim base 20

**WEIGHT** (kg)  
 Standard Base 800  
 Slim Base 900

**STANDARD GLAZING**  
 EN1063 BR3/S  
 EN365 P6B

# DATASHEET

## SAFETELL SECURITY PORTALS

### DDA APPROVED CIRCLE PORTALS

A high security solution to control entry and exit to internal secure areas. Available as larger DDA circle and square units to meet existing building aesthetics and client needs. Our Security Portals offer single person passage checking and abandoned object detection systems with a DDA approved wide passage. Available with a range of security resistance levels including EN1627 RC4 Manual Attack rating and EN1522 FB4 Ballistic Rating. Our Security Portals are designed to be integrated with any access control system.

#### MAIN FEATURES

- SA249 is a removable structure
- Weighing floor system (abandoned object detection, weight higher than 200 grams)
- Single person detection (anti-hostage system)
- Paint finish is embossed, according to RAL colour scale, or Stainless Steel covering
- Traffic light panels & multilingual automated voiceover for transit communications
- Portal console with digital display and menu-guided commands
- Throughput is dependant on model and accessories

#### OPTIONAL

- Emergency exit management
- Camera
- Card reader
- Infrared sensor for presence monitoring
- Biometric registration system - Biobank
- Anti-masking system face detection
- CEIA metal detector
  - Metal detector CEIA 02PN8HIPE/CF
  - Metal detector CEIA 02PN8HIPE




DDA Approved Circle Security Portal

**SERVICE &  
 MAINTENANCE  
 AVAILABLE**

**+44 (0) 1322 223 233**

sales@safetell.co.uk safetell.co.uk

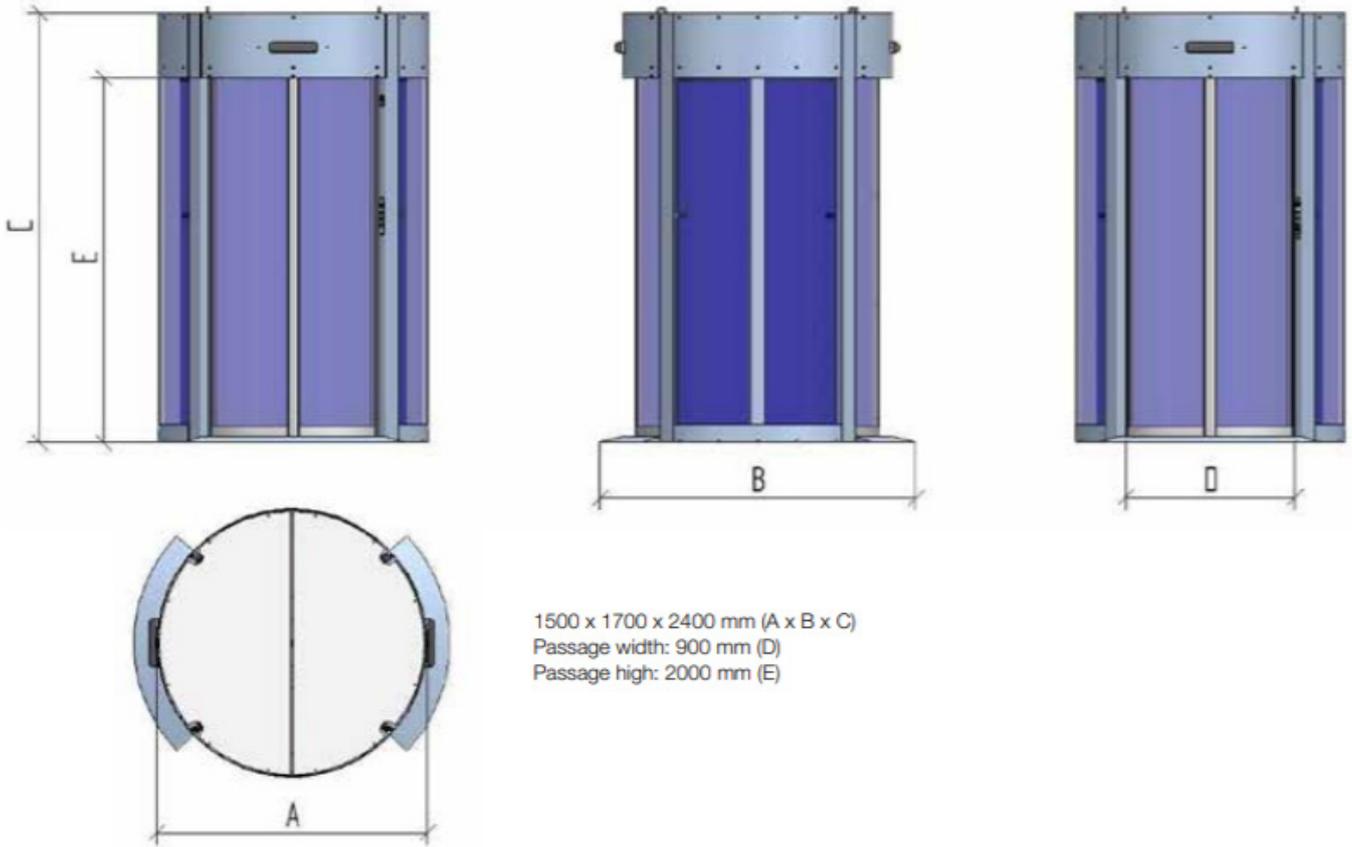

WE ARE FULLY ACCREDITED



+44 (0) 1322 223 233

sales@safetell.co.uk safetell.co.uk



**Safetell**  
 SECURITY | MAINTENANCE