


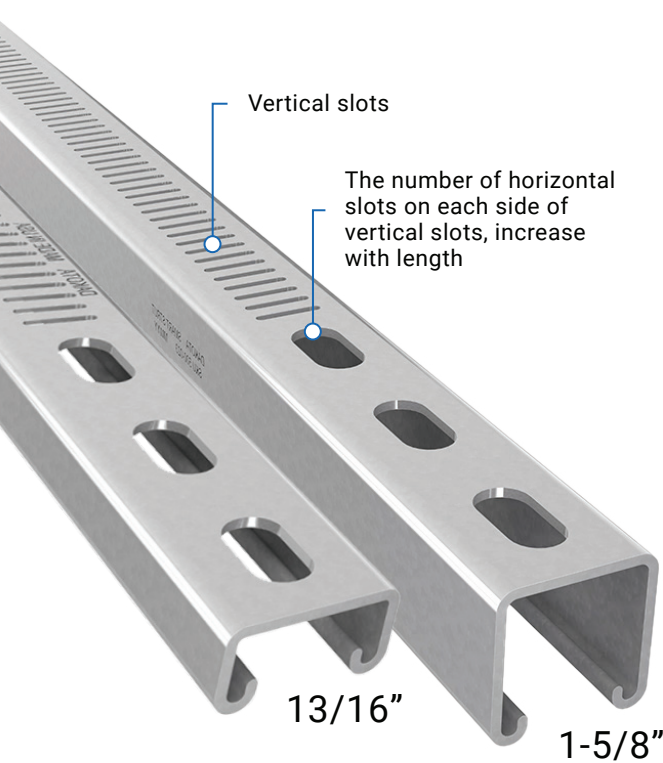

SMART-STRUT™

Features & Benefits

- Easily prefabricated
- Pre-cut lengths
- High-grade material
- 10x Labor saving
- Clean and organized appearance






bimobject®

Product Details


Material: 12 Gauge Structural Steel, Grade 50

Finish: Pre-galvanized Zinc

Applications: Electrical

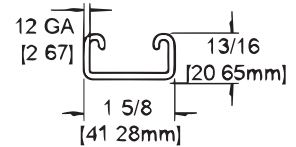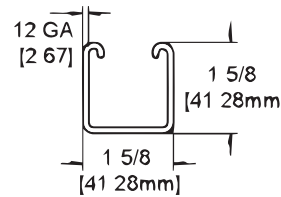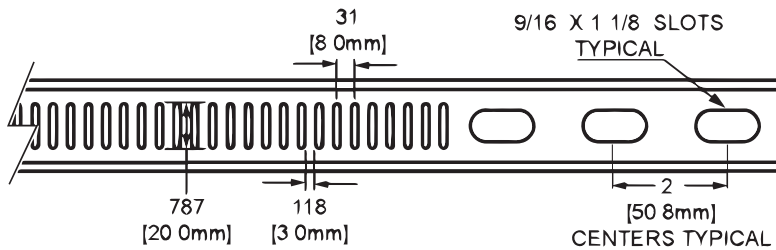

PRE-CUT LENGTHS OF STRUT

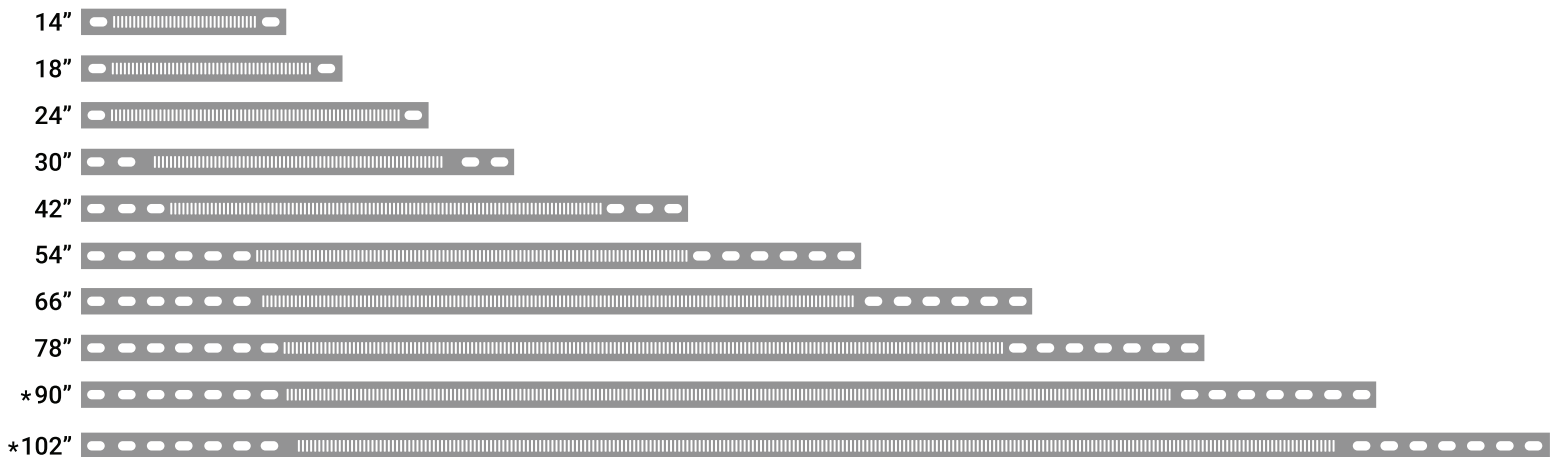

* Not available in 13/16" Smart-Strut

SMART-STRUT™ SPECIFICATIONS

1-5/8" x 1-5/8" Strut Channel

PART#	LENGTH	GAUGE	HEIGHT	HORIZONTAL SLOTS	VERTICAL SLOTS	SUSPENDED SPAN
DS-SS15812-14-PG	1' 2" (14")	12 GA.	1-5/8"	2	32	12"
DS-SS15812-18-PG	1' 6" (18")			2	44	16"
DS-SS15812-24-PG	2' 0" (24")			2	64	22"
DS-SS15812-30-PG	2' 6" (30")			4	64	24"
DS-SS15812-42-PG	3' 6" (42")			6	96	36"
DS-SS15812-54-PG	4' 6" (54")			12	96	48"
DS-SS15812-66-PG	5' 6" (66")			12	128	60"
DS-SS15812-78-PG	6' 6" (78")			14	160	72"
DS-SS15812-90-PG	7' 6" (90")			14	192	84"
DS-SS15812-102-PG	8' 6" (102")			14	224	96"

1-5/8" x 13/16" Strut Channel

PART#	LENGTH	GAUGE	HEIGHT	HORIZONTAL SLOTS	VERTICAL SLOTS	SUSPENDED SPAN
DS-SS131612-14-PG	1' 2" (14")	12 GA.	13/16"	2	32	12"
DS-SS131612-18-PG	1' 6" (18")			2	44	16"
DS-SS131612-24-PG	2' 0" (24")			2	64	22"
DS-SS131612-30-PG	2' 6" (30")			4	64	24"
DS-SS131612-42-PG	3' 6" (42")			6	96	36"
DS-SS131612-54-PG	4' 6" (54")			12	96	48"
DS-SS131612-66-PG	5' 6" (66")			12	128	60"
DS-SS131612-78-PG	6' 6" (78")			14	160	72"