

SMART-NUT™



Features & Benefits

- No threading required
- High strength yield
- No de-burring of threaded rods required
- Simplifies multiple level trapeze installation
- To be used with 9/16" x 1-1/8" strut holes



Smart-Nuts™ act as an all-in-one nut and washer for threaded rods, making strut systems easier to install. Sizing clips are included for free with each order.



Smart-Nut Sizing Clip

Strut slots (9/16" x 1 1/8") may be slightly different per manufacturer.

If you feel the nut is not tight enough when doing the install, attach a sizing clip to the interior lip of the strut slot.


Re-install the nut for secure fit.



SMART-NUT™ INSTALLATION



1. SNAP ONTO ROD

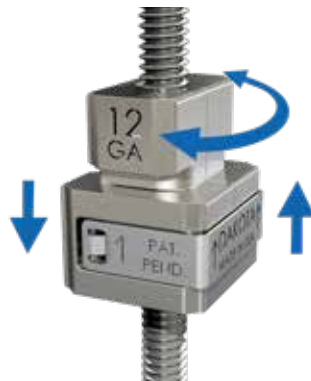

2. ADJUST UP OR DOWN




3. INSERT INTO STRUT



4. 1/4 TURN

SMART-NUT™ SPECIFICATIONS

A HEAD WIDTH	B HEIGHT	C WIDTH	D LENGTH
12 mm (0.472 in)	25.92 mm (1.020 in)	20 mm (0.787 in)	22 mm (0.866 in)

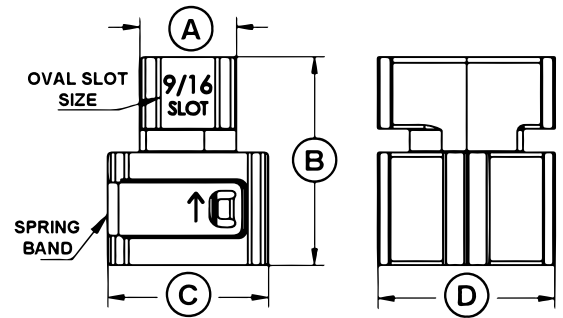

PART#	GAUGE	THREAD	SPRING BAND	INSTALL A LOAD RATING 3X SAFETY FACTOR	INSTALL B LOAD RATING 3X SAFETY FACTOR
DS-NUT-14-14-EG	14	1/4"-20	GOLD	450 lbs	350 lbs
DS-NUT-14-38-EG		3/8"-16		450 lbs	350 lbs
DS-NUT-12-14-EG	12	1/4"-20	SILVER	800 lbs	600 lbs
DS-NUT-12-38-EG		3/8"-16		800 lbs	600 lbs

