



RIGID IPS SMART-CLAMPS™

Features & Benefits

- Quickly installed & removed
- High strength yield
- No power tools required
- Clean, organized appearance
- Single piece of hardware, ready-to-use





bimobject

Product Details

Material: SAE Austempered Spring Steel



Finish: Dakota ProTect™ Wet/Dry: 1000hr SST

Applications: Mechanical

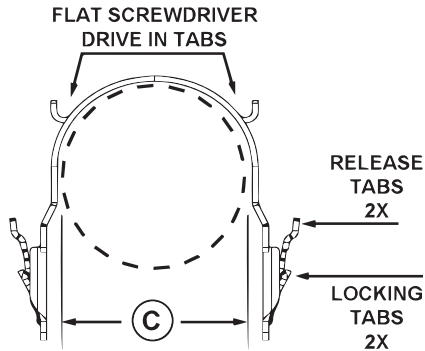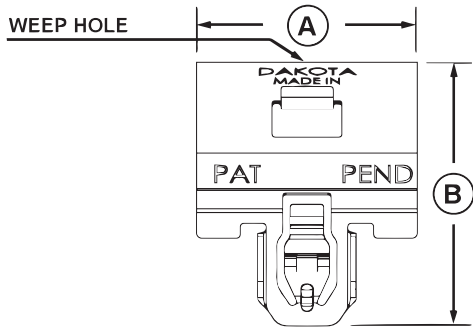

RIGID IPS SMART-CLAMPS™

PART#	DESCRIPTION	A - WIDTH	B - HEIGHT	C - PIPE DIAMETER	MAX LOAD RATING (3X SAFETY FACTOR)
DS-PC-12IPS-PT	1/2" Rigid IPS Conduit Clamp	1.496" (38.0mm)	1.579" (40.1mm)	0.840" (21.3mm)	400 lbs
DS-PC-34IPS-PT	3/4" Rigid IPS Conduit Clamp	1.496" (38.0mm)	1.789" (45.4mm)	1.050" (26.6mm)	
DS-PC-1IPS-PT	1" Rigid IPS Conduit Clamp	1.496" (38.0mm)	2.031" (51.6mm)	1.315" (33.4mm)	
DS-PC-114IPS-PT	1-1/4" Rigid IPS Conduit Clamp	1.496" (38.0mm)	2.391" (60.7mm)	1.660" (42.1mm)	
DS-PC-112IPS-PT	1-1/2" Rigid IPS Conduit Clamp	1.496" (38.0mm)	2.630" (66.8mm)	1.900" (48.2mm)	
DS-PC-2IPS-PT	2" Rigid IPS Conduit Clamp	1.496" (38.0mm)	3.110" (79.0mm)	2.375" (60.3mm)	

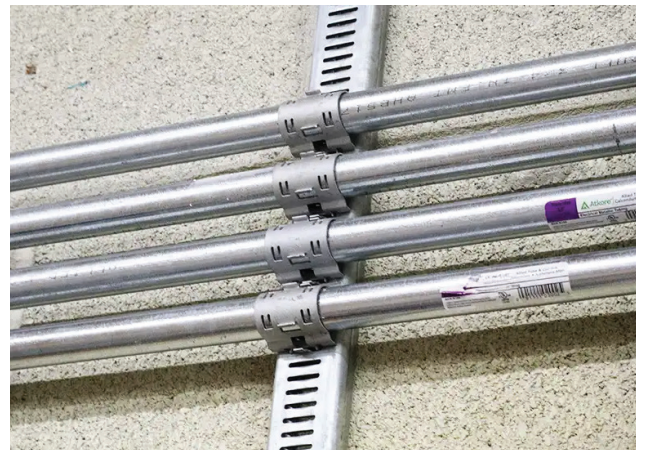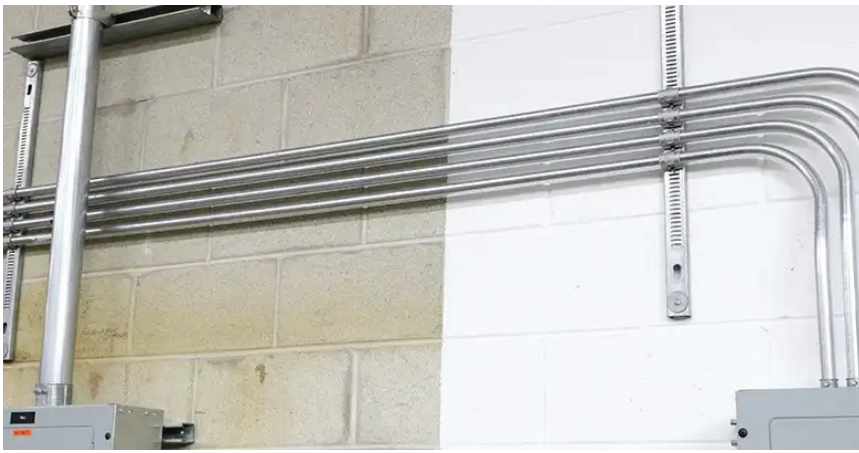


SMART-CLAMP™ INSTALLATION TIPS

To install, insert the tabs of the Smart-Clamp™ into the vertical slots.

Push down until it clicks in place, use a flat head screwdriver to ensure engagement.

To remove, push the locking tabs inward to disengage and pry out.

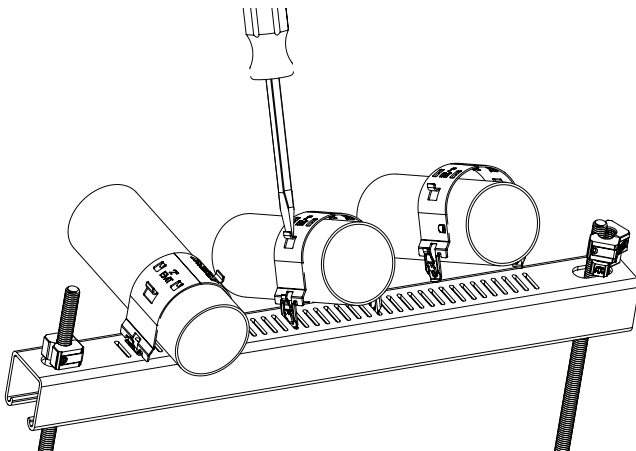

400lbs
SAFE WORKING LOAD

