


Filiofocus

CREATED IN 2000

DESIGN: DOMINIQUE IMBERT

In 2000, star architect Norman Foster commissioned Focus to create a custom-designed fireplace for the vast reception area of the London head office of a major company. This gave rise to the Filiofocus with its tapering telescopic hood.

With the fire on its welcoming hearth visible from everywhere in a room, the Filiofocus has won over design enthusiasts in the hotel and restaurant industry the world over who have chosen it for their reception, relaxation or dining areas.

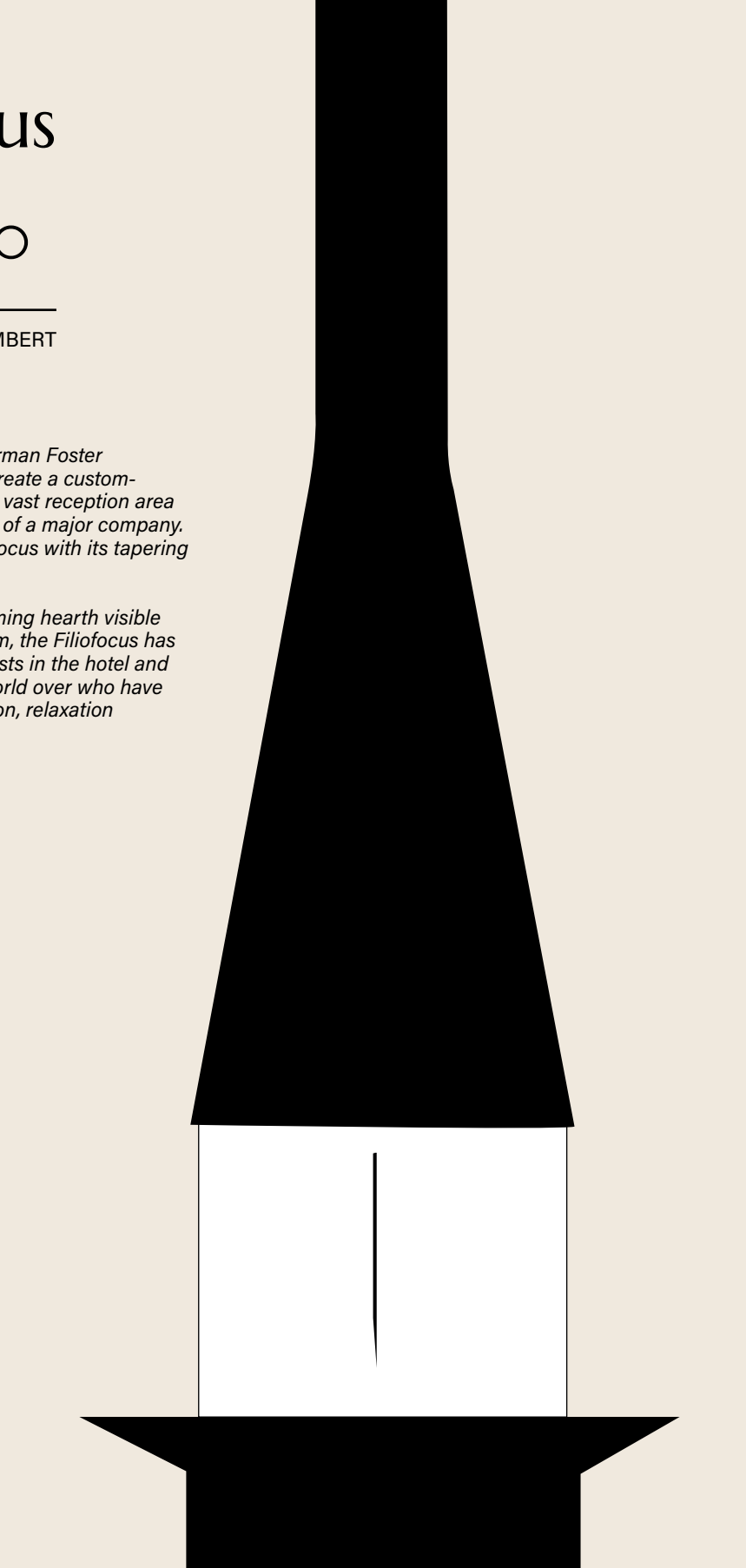

focus[®]

CREATE BEYOND CONVENTION

Filiofocus

1600

gas



In 2024, a new gas version of the Filiofocus was launched. Developed in collaboration with the German manufacturer Deco Gasfeuer, its burner is designed in perfect harmony with the fire basin. The flame play is stunningly similar to a real wood fire and can be adjusted via remote control.



Filiofocus

1600

gas



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)			FLUE WEIGHT (kg/linear metre)
2385	1120	1120	Hood 76	Base 80	Burner 17	16

DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
250	250	250	250

SAFETY DISTANCE FROM GLASS SURFACES (mm)

500

TECHNICAL SPECIFICATIONS

NATURAL GAS HEAT OUTPUT (kW)	PROPANE HEAT OUTPUT (kW)	NATURAL GAS CONSUMPTION (m ³ /h)	PROPANE CONSUMPTION (kg/h)
13.5	15	1.3	0.56

ELECTRICAL POWER SUPPLY

Batteries

NUMBER OF GLASS PANELS

4 glass panels: 2 fixed, 2 sliding

FINISH


Black

White

Filiofocus

1600

gas

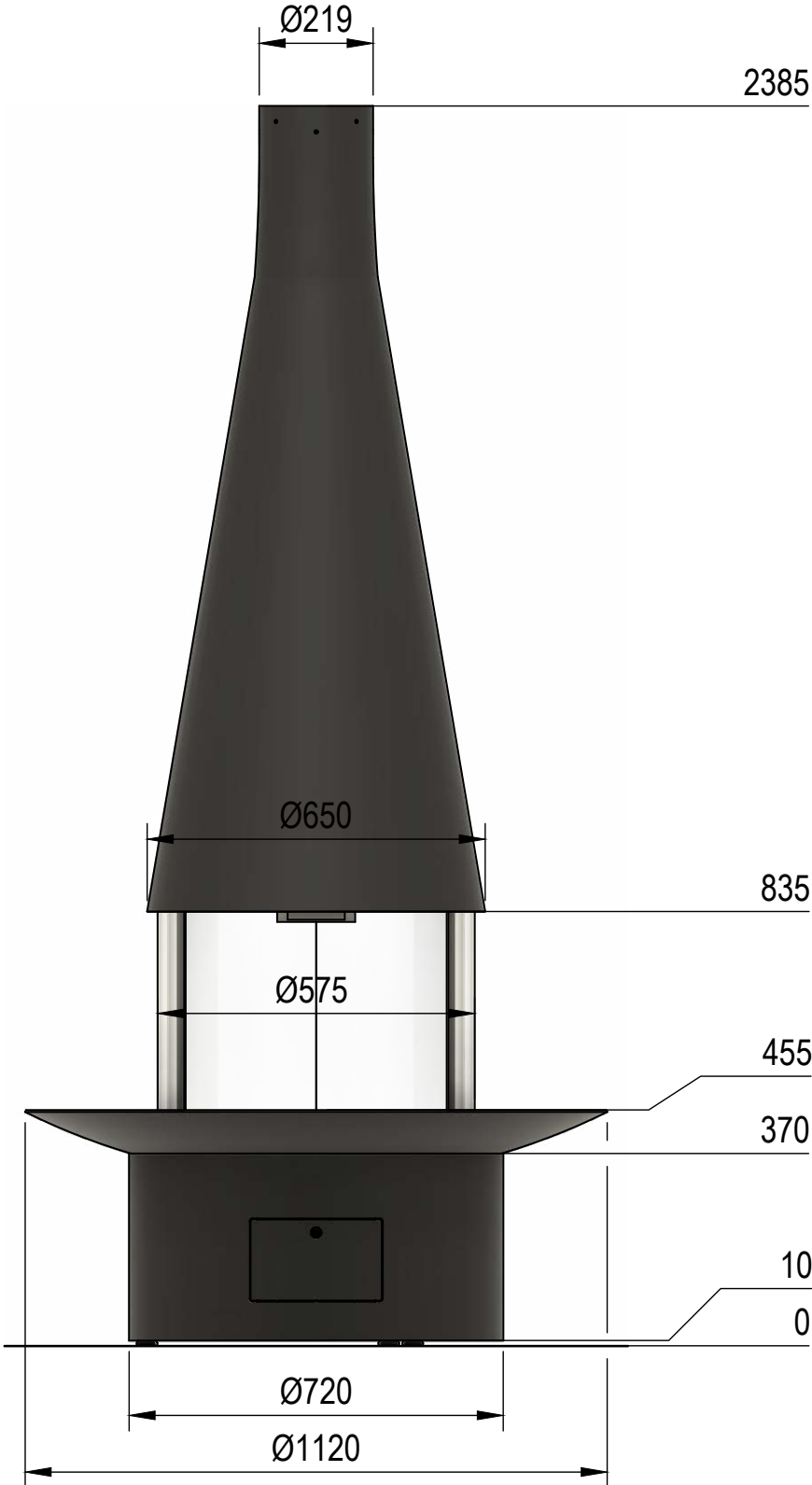

Filiofocus

2000

gas



Filiofocus

2000

gas



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)			FLUE WEIGHT (kg/linear metre)
2900	1160	1160	Hood 86	Base 80	Burner 17	22

DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
250	250	250	250

SAFETY DISTANCE FROM GLASS SURFACES (mm)

500

TECHNICAL SPECIFICATIONS

NATURAL GAS HEAT OUTPUT (kW)	PROPANE HEAT OUTPUT (kW)	NATURAL GAS CONSUMPTION (m ³ /h)	PROPANE CONSUMPTION (kg/h)
13.5	15	1.3	0.56

ELECTRICAL POWER SUPPLY

Batteries

NUMBER OF GLASS PANELS

4 glass panels: 2 fixed, 2 sliding

FINISH


Black

White

Filiofocus

2000

gas

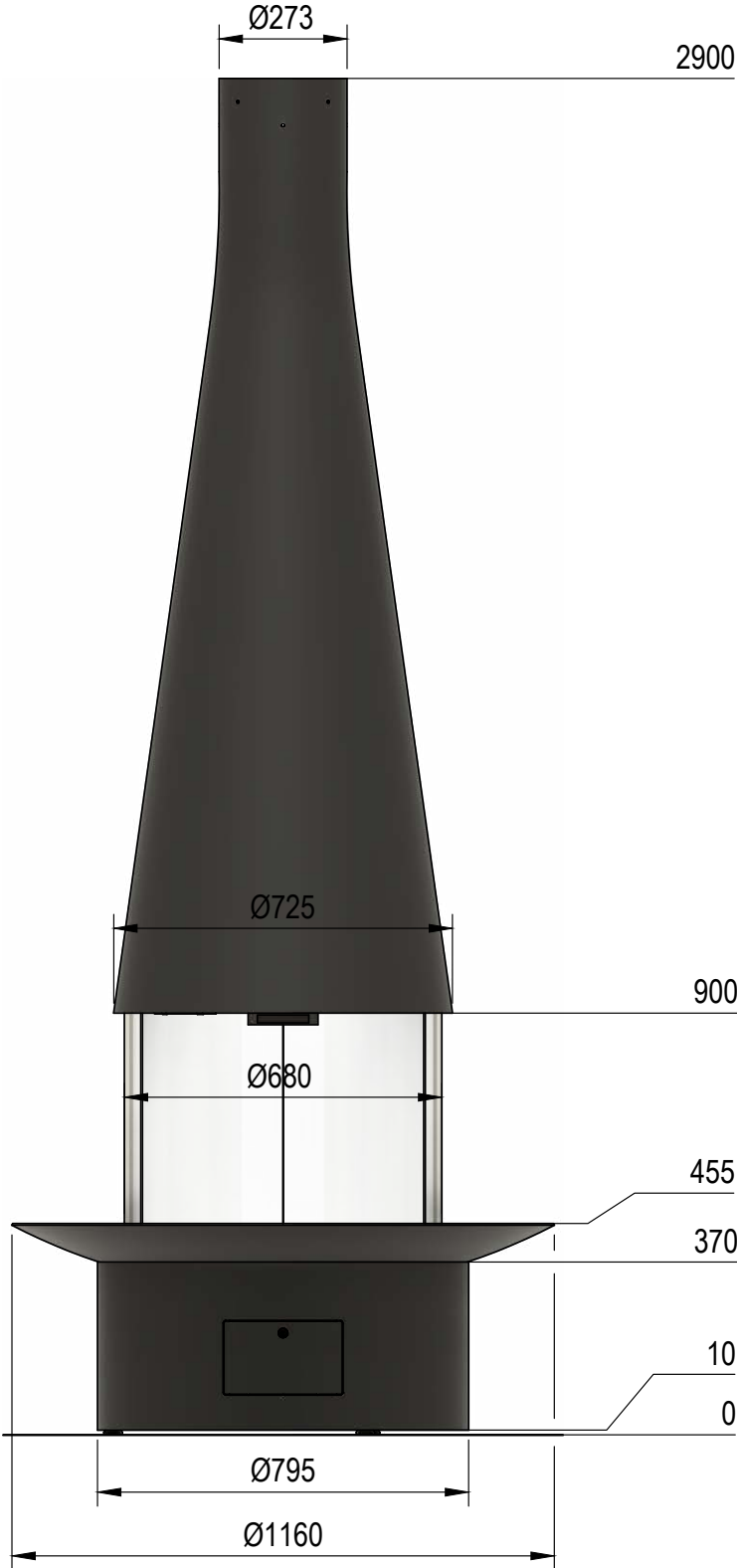

Filiofocus

1600

bioethanol



Freedom of installation, total ease of use

The Filiofocus is also available in a bioethanol version for maximum versatility. Operated by remote control, its open flames dance in a glass cylinder, offering fire in its purest form. Smokeless, requiring no external flue outlet, this iconic fireplace can now be installed in any space: in apartments, on any floor, or in areas with wood-burning restrictions.



Filiofocus

1600

bioethanol



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)			FLUE WEIGHT (kg/linear metre)
			Hood	Base	Burner	
2385	1120	1120	76	80	16	16

DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
500	500	500	0

SAFETY DISTANCE FROM GLASS SURFACES (mm)

500

WITH EXTERNAL OUTLET

HEAT OUTPUT (kW)	TANK CAPACITY (L)	AUTONOMY (h)	MIN. CEILING VOLUME (m ³)
6.5	13.5	13 h 30 min	0

WITHOUT EXTERNAL OUTLET

HEAT OUTPUT (kW)	TANK CAPACITY (L)	AUTONOMY (h)	MIN. CEILING HEIGHT (m)	MIN. ROOM VOLUME (m ³)
5.5	13.5	14 h 30 min	2.84	125

NUMBER OF GLASS PANELS

4 glass panels: 2 fixed, 2 sliding

ELECTRICAL POWER SUPPLY

Batteries


FINISH

Black	White
-------	-------

Filiofocus

1600

bioethanol

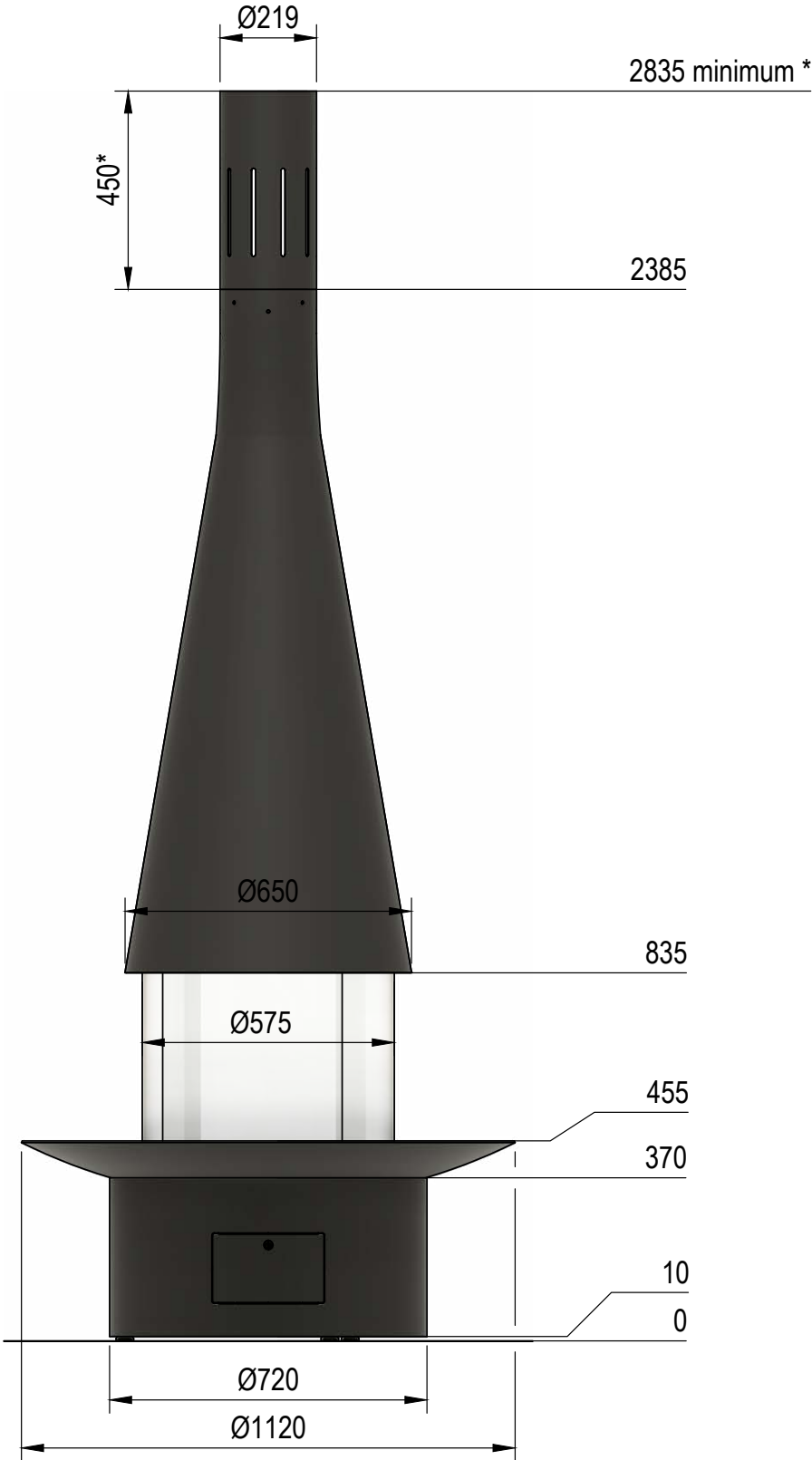

*if not connected to an external outlet

focus[®]

CREATE BEYOND CONVENTION

