

Bathyscafocus


& Emifocus

1978

DESIGN: DOMINIQUE IMBERT

Taking its name from a deep-sea submersible, the spherical, suspended Bathyscafocus is evocative of underwater exploration.

Its rounded, compact design is as resolutely contemporary as ever.

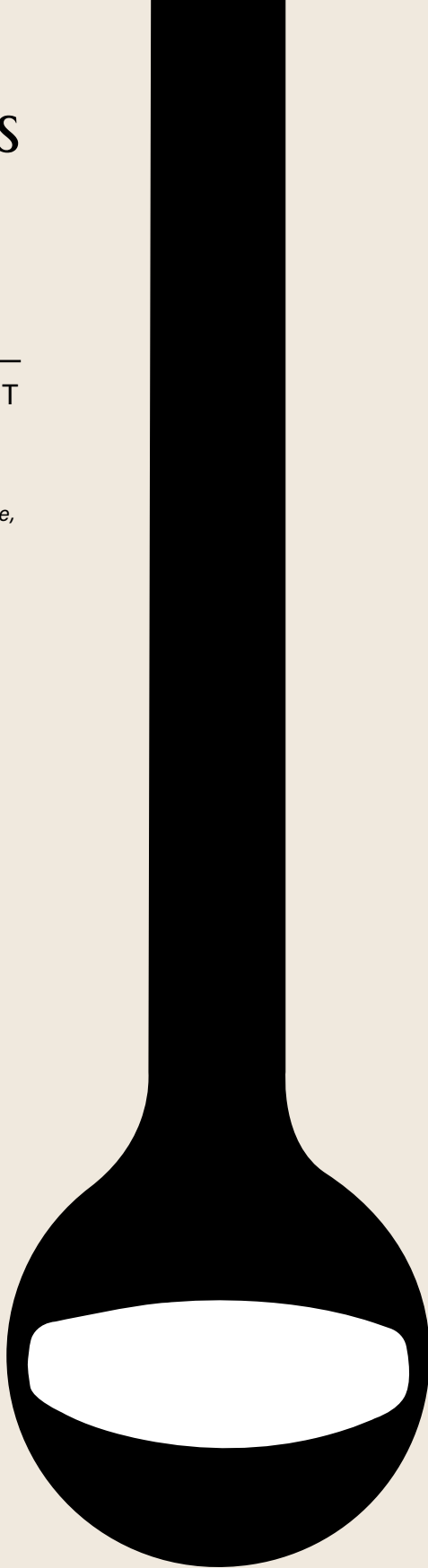

focus[®]

CREATE BEYOND CONVENTION

Bathyscafocus

WITH PORTHOLE

wood-burning (Ecodesign)



The closed Bathyscafocus with porthole boasts exceptional energy efficiency and high environmental performance. The heat-resistant safety glass offers an unimpeded view of the fire.



Bathyscafocus

WITH PORTHOLE

wood-burning (Ecodesign)



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
810	700	700	74	16

SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	500	700	500

SAFETY DISTANCE FROM GLASS SURFACES (mm)

1000

TECHNICAL SPECIFICATIONS

HEAT OUTPUT (kW)	EFFICIENCY (%)	MINIMUM ROOM VOLUME (m ³)
19	83	80

FINISH

Black

Bathyscafocus

WITH PORTHOLE

wood-burning (Ecodesign)



Bathyscafocus

electric (Holographik®)



This model's stunningly lifelike virtual fire playing over ultra-realistic ceramic logs is made possible by a patented holographic system. The multi-sensory experience can be enhanced by the sound of a crackling fire and a choice of scents.

With flame play that can be adjusted at the touch of a button, this electric fire can be installed in virtually any context: apartments, offices and spaces that welcome the public such as hotels, restaurants or boutiques, as well as locations where wood-burning is prohibited.



Bathyscafocus

electric (Holographik®)



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
810	700	700	65	16

TECHNICAL SPECIFICATIONS

CONSUMPTION (W)

26

ELECTRICAL POWER SUPPLY

220-240 V / 50 Hz


FINISH

Black

White

Bathyscafocus

electric (Holographik®)

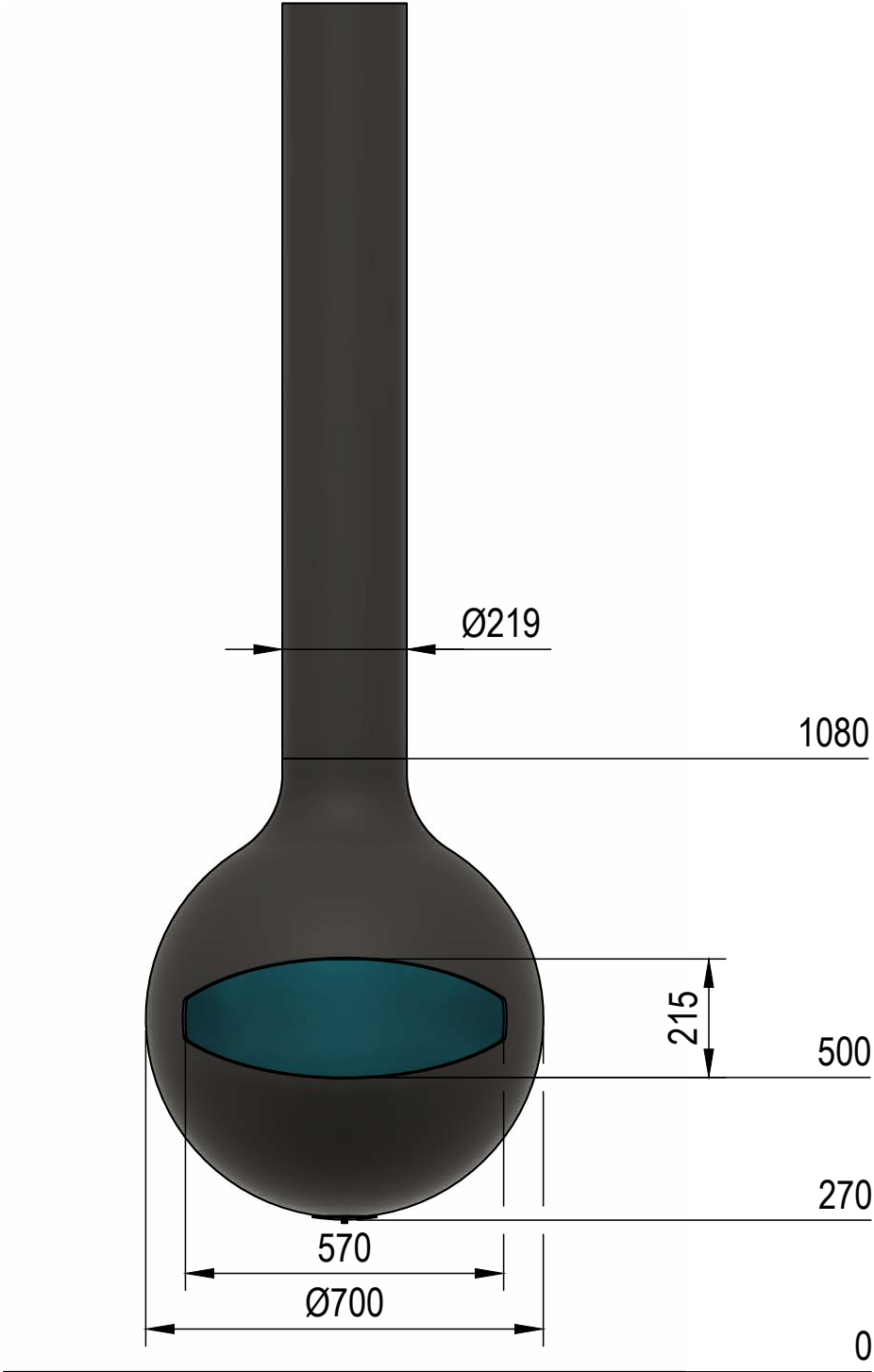

Bathyscafocus

ON A BASE

gas



The gas Bathyscafocus offers contemporary design allied with convenience: an attractive fire on demand whose heat can be easily adjusted by remote control. The visual impact of this stylish fireplace is uncompromised as the gas is supplied through its base.



Bathyscafocus

ON A BASE

gas



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
1110	700	700	74	16

DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
250	250	250	0

SAFETY DISTANCE FROM GLASS SURFACES (mm)

500

TECHNICAL SPECIFICATIONS

NATURAL GAS HEAT OUTPUT (kW)	PROPANE HEAT OUTPUT (kW)	NATURAL GAS CONSUMPTION (m ³ /h)	PROPANE CONSUMPTION (m ³ /h)
9	7.8	0.89	0.31

ELECTRICAL POWER SUPPLY

Batteries


FINISH

Black	White
-------	-------

Bathyscafocus

ON A BASE

gas

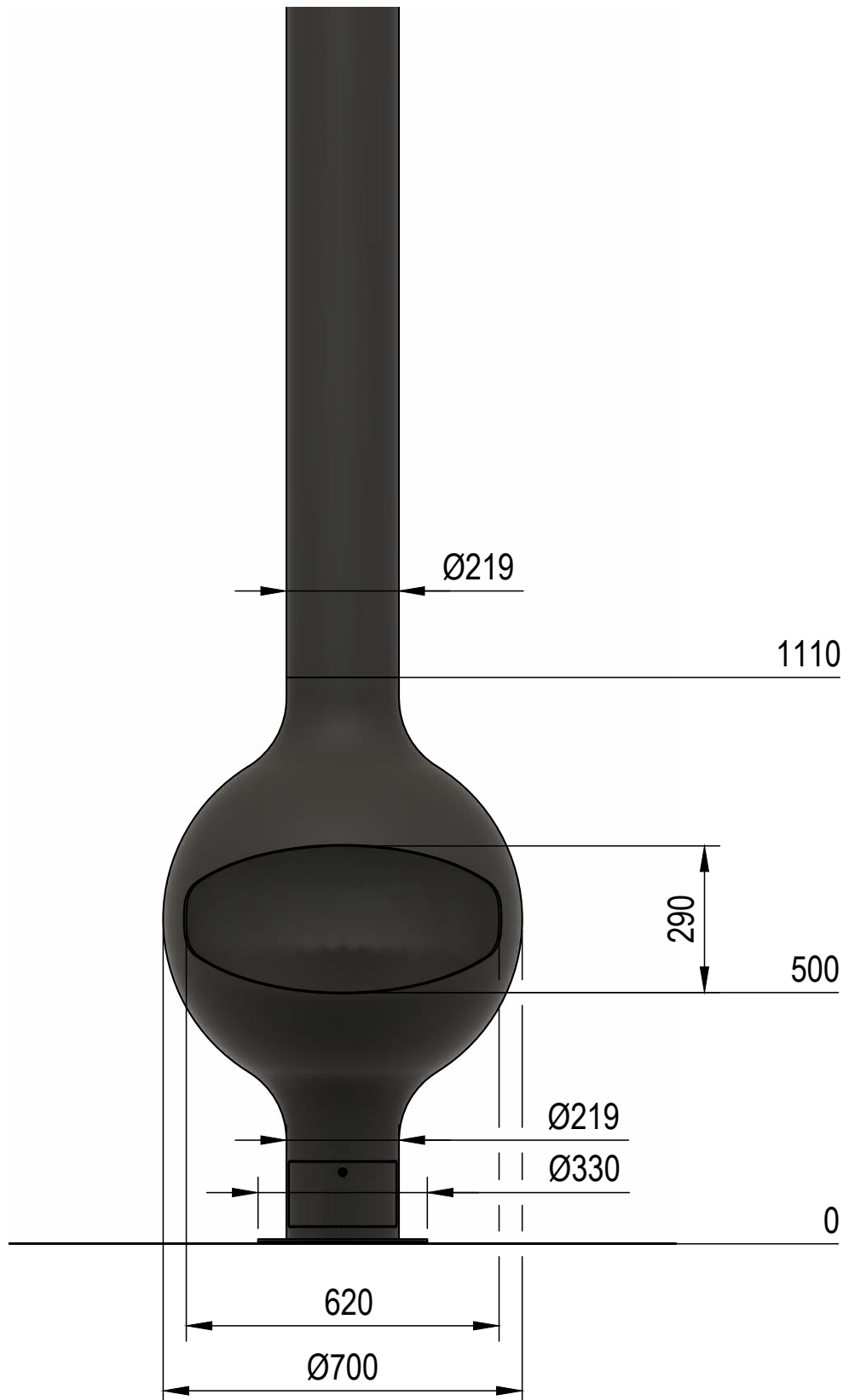

Bathyscafocus

outdoor (wood-burning)



The outdoor models are available with a black anti-corrosion finish or a rusted finish, both developed by Focus for exterior use. The rusted surface gradually changes, so the patina gains character over time.



Bathyscafocus

outdoor (wood-burning)



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
810	700	700	57	16

DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	800	800	400

SAFETY DISTANCE FROM GLASS SURFACES (mm)


500

FINISH

Outdoor black	Rusted steel
---------------	--------------

Bathyscafocus

outdoor (wood-burning)

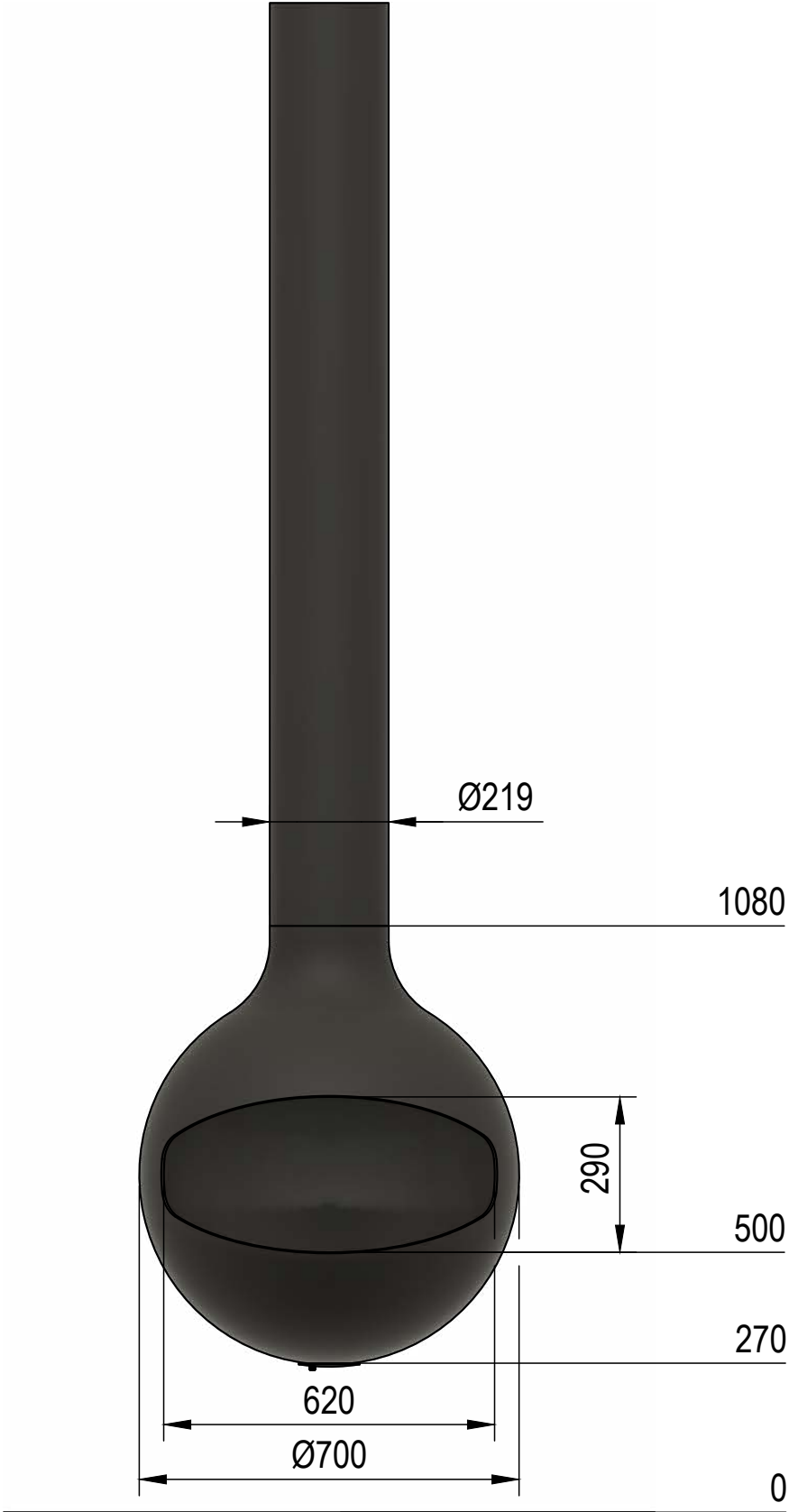

Emifocus

VERTICAL OUTLET WITH PORTHOLE

wood-burning (Ecodesign)



The Emifocus is similar to the Bathyscafocus in design, but is mounted on the wall. It can be installed with a vertical flue so that it appears suspended from the ceiling, or with no visible flue (rear outlet) as a simple half-sphere.

It takes its name from the Japanese girl's name "Emi" – in kanji 恵 (blessing, grace, kindness) and 美 (beauty), which can be translated as "blessed beauty", a name in keeping with the model's streamlined purity inspired by Zen minimalism.



Emifocus

VERTICAL OUTLET WITH PORTHOLE

wood-burning (Ecodesign)



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
775	700	480	76	16

SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	N/A	700	500

SAFETY DISTANCE FROM GLASS SURFACES (mm)

1000

TECHNICAL SPECIFICATIONS

HEAT OUTPUT (kW)	EFFICIENCY (%)	MINIMUM ROOM VOLUME (m ³)
9	78	80


FINISH

Black

Emifocus

VERTICAL OUTLET WITH PORTHOLE

wood-burning (Ecodesign)

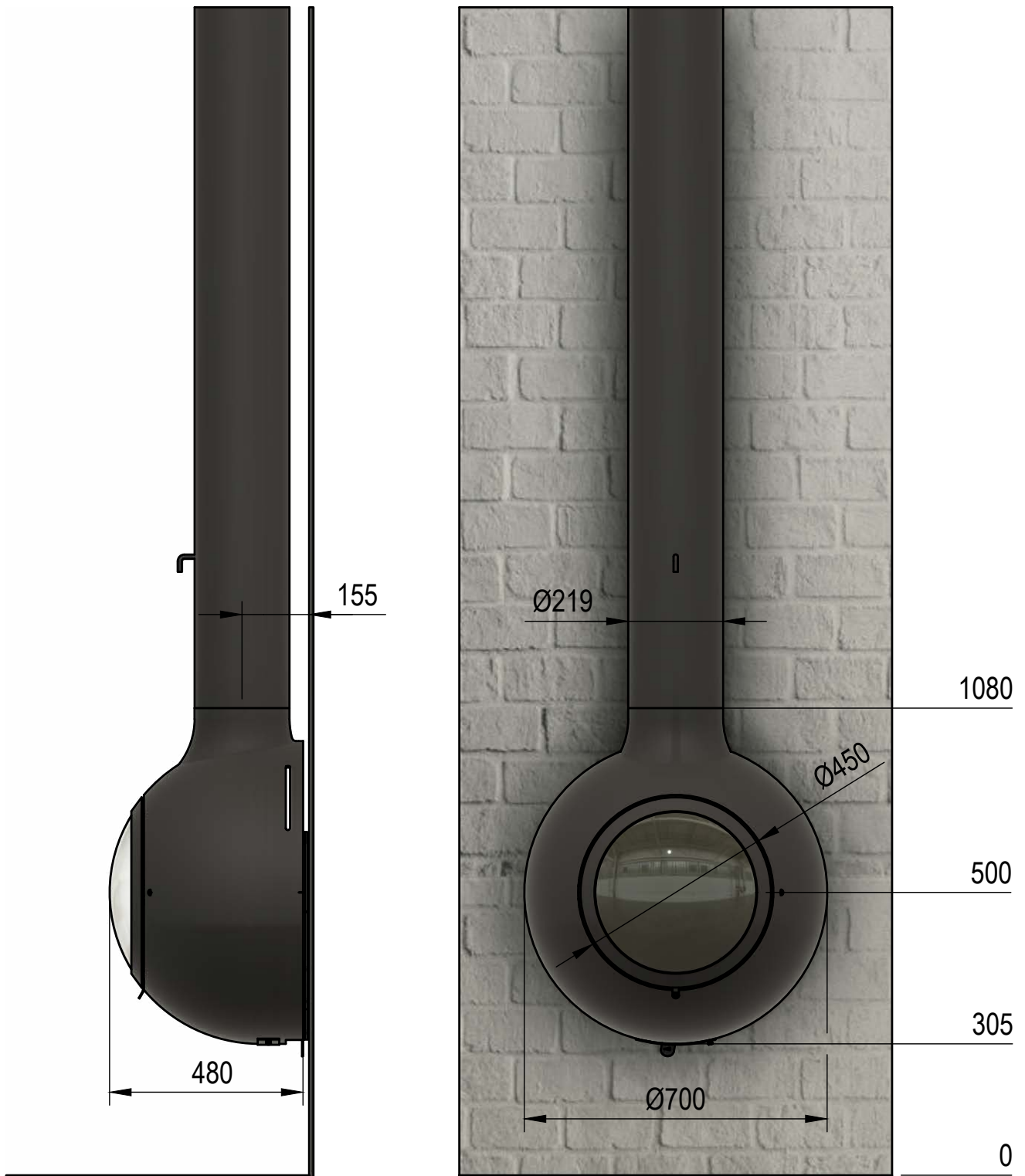

Emifocus

REAR OUTLET WITH PORTHOLE

wood-burning (Ecodesign)



Emifocus

REAR OUTLET WITH PORTHOLE

wood-burning (Ecodesign)



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
700	700	480	76	16

SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	N/A	700	500

SAFETY DISTANCE FROM GLASS SURFACES (mm)

1000

TECHNICAL SPECIFICATIONS

HEAT OUTPUT (kW)	EFFICIENCY (%)	MINIMUM ROOM VOLUME (m ³)
9	78	80


FINISH

Black

Emifocus

REAR OUTLET WITH PORTHOLE

outdoor (wood-burning)

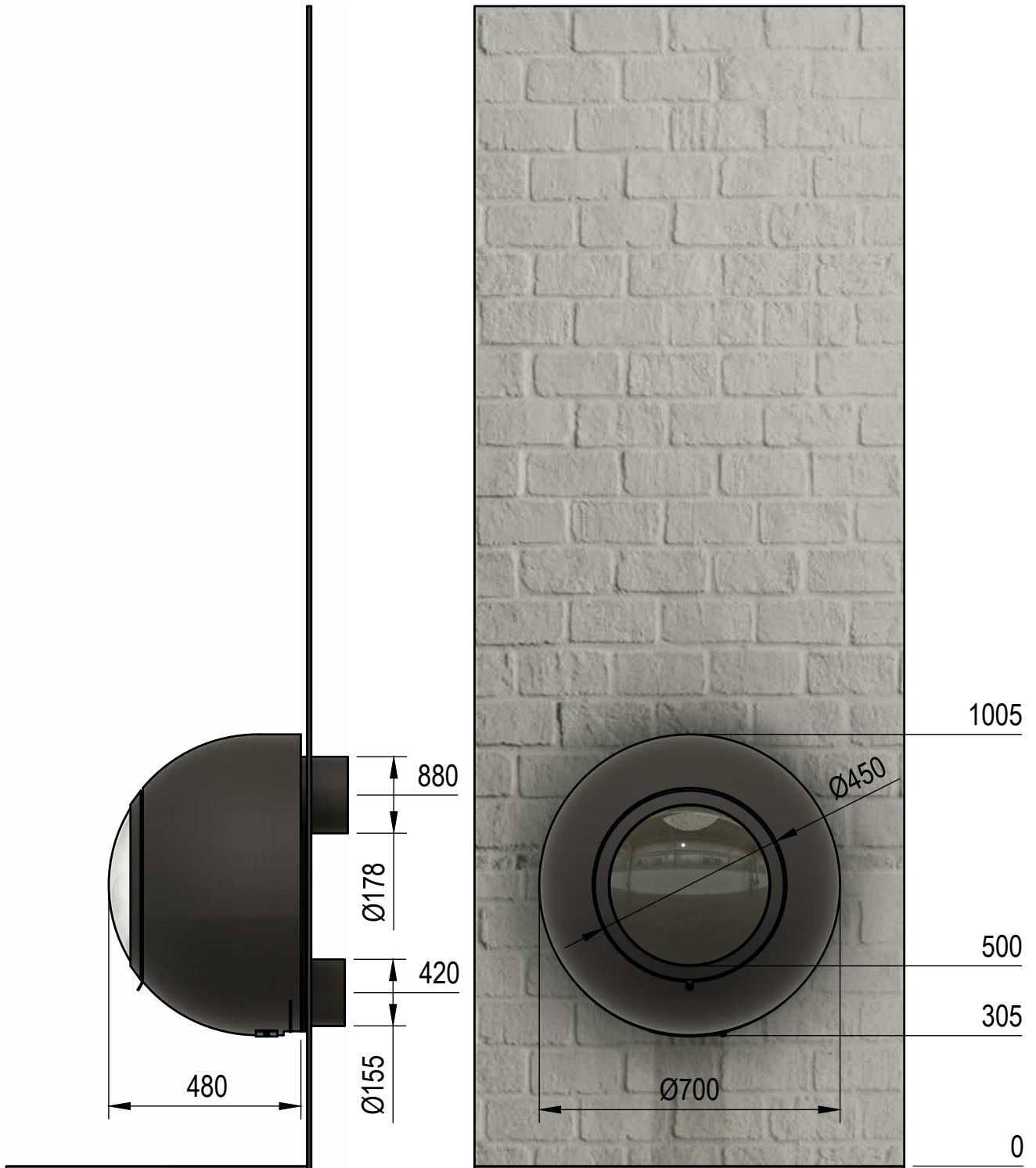

Emifocus

outdoor (wood-burning)



The outdoor models are available with a black anti-corrosion finish or a rusted finish, both developed by Focus for exterior use. The rusted surface gradually changes, so the patina gains character over time.



Emifocus

outdoor (wood-burning)



DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
775	700	420	65	16

SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	N/A	800	0

SAFETY DISTANCE FROM GLASS SURFACES (mm)


500

FINISH

Outdoor black	Rusted steel
---------------	--------------

Emifocus

outdoor (wood-burning)

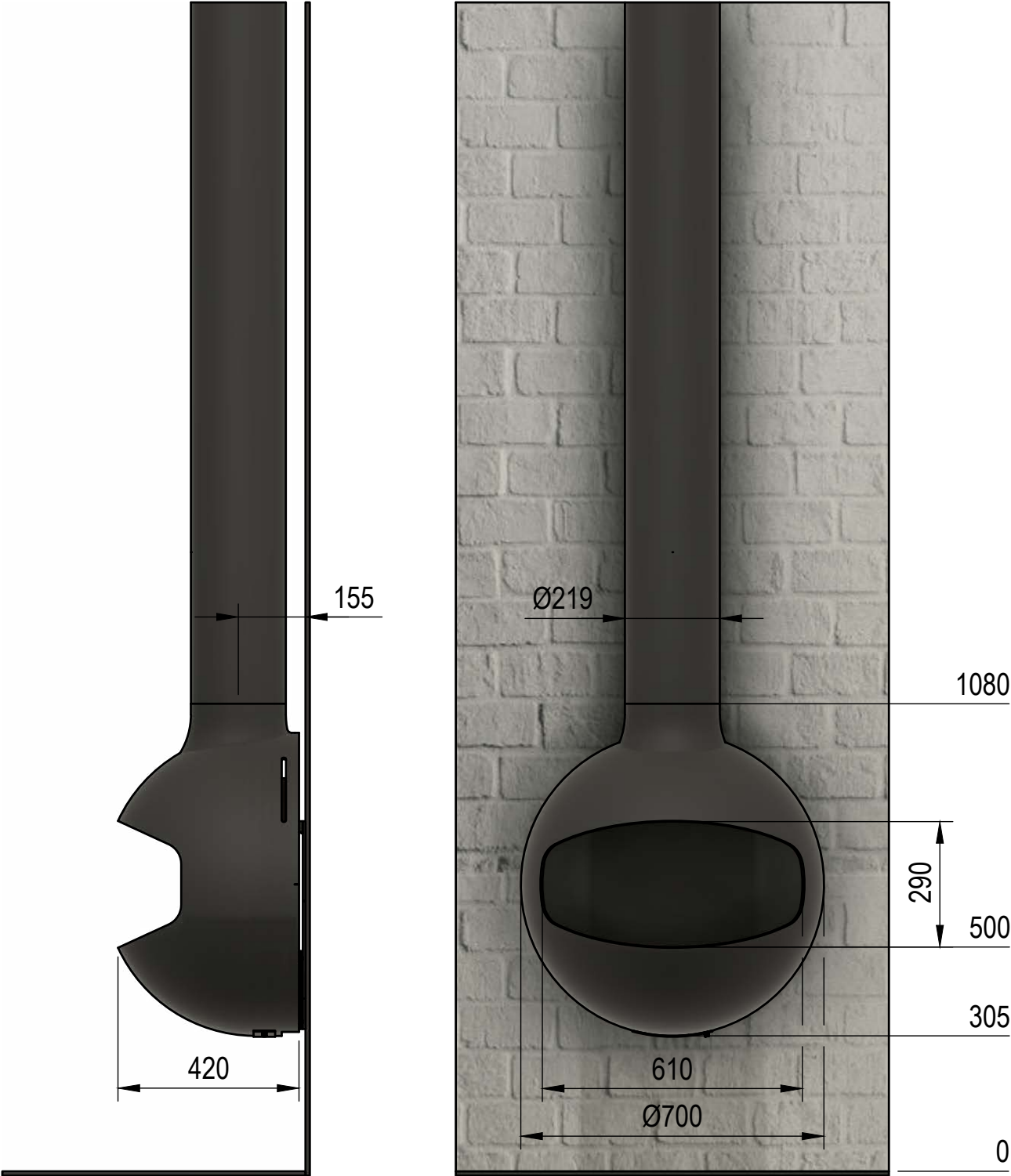

focus[®]

CREATE BEYOND CONVENTION

