

# Ergofocus

& Paxfocus

1983

---

DESIGN: DOMINIQUE IMBERT

*The timeless design of the Ergofocus, created in 1983, earned it the honour of being exhibited at Stockholm's Museum of Modern Art.*

*Four decades on, it now exists in four different fuel types to suit every requirement and environment.*

*Its streamlined shape, ergonomic design and compact size make the Ergofocus a perfect fit for any space, multiplying the possibilities to have a suspended, pivoting fireplace in an interior.*



**focus**<sup>®</sup>

CREATE BEYOND CONVENTION

# Ergofocus

wood-burning (Ecodesign)



## 2022 WOOD-BURNING

*The Ergofocus has been reissued in a closed, ecodesigned version, replacing the open wood version. It offers excellent energy and environmental performance.*



# Ergofocus

wood-burning (Ecodesign)



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
690	950	950	150	16

## SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	500	500	40

## SAFETY DISTANCE FROM GLASS SURFACES (mm)

1000
------

## TECHNICAL SPECIFICATIONS


HEAT OUTPUT (kW)	EFFICIENCY (%)	MINIMUM ROOM VOLUME (m <sup>3</sup> )
10	80	80

## FINISH

Black
-------

# Ergofocus

wood-burning (Ecodesign)

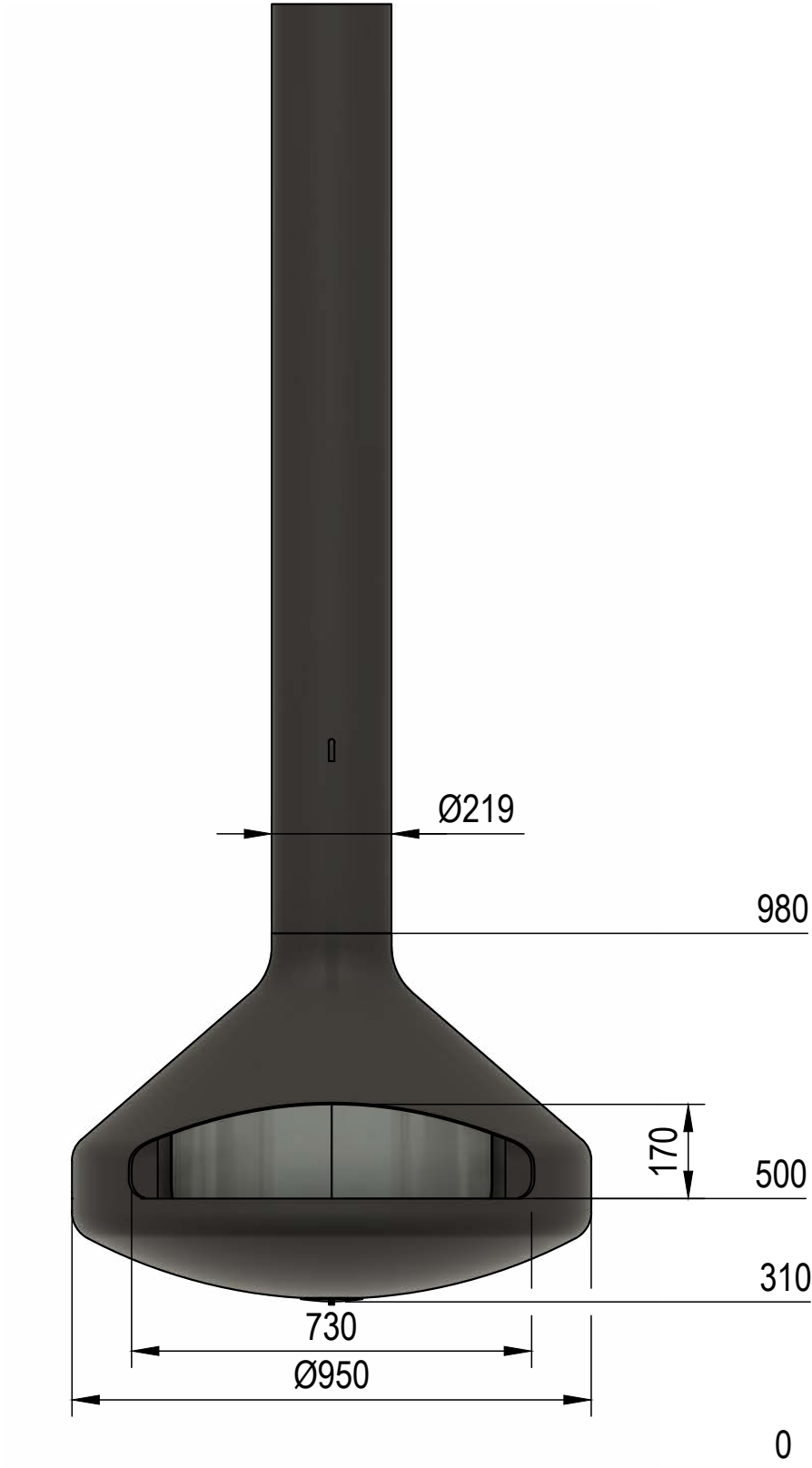

# Ergofocus

electric (Holographik®)



## 2023 HOLOGRAPHIK®

*The Holographik® Ergofocus offers a unique sensory experience, with virtual flames, the sound of a crackling fire and optional gentle heat diffusion through the flue. This electric fire is the ideal solution to enhance a space with a Focus fireplace without the need for an external flue outlet. All you need is an electrical connection.*



# Ergofocus

electric (Holographik®)



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
690	950	950	90	16

## TECHNICAL SPECIFICATIONS

CONSUMPTION (W)

100

## ELECTRICAL POWER SUPPLY

100 à 240 V / 50 à 60 Hz


## FINISH

Black

White

# Ergofocus

electric (Holographik®)

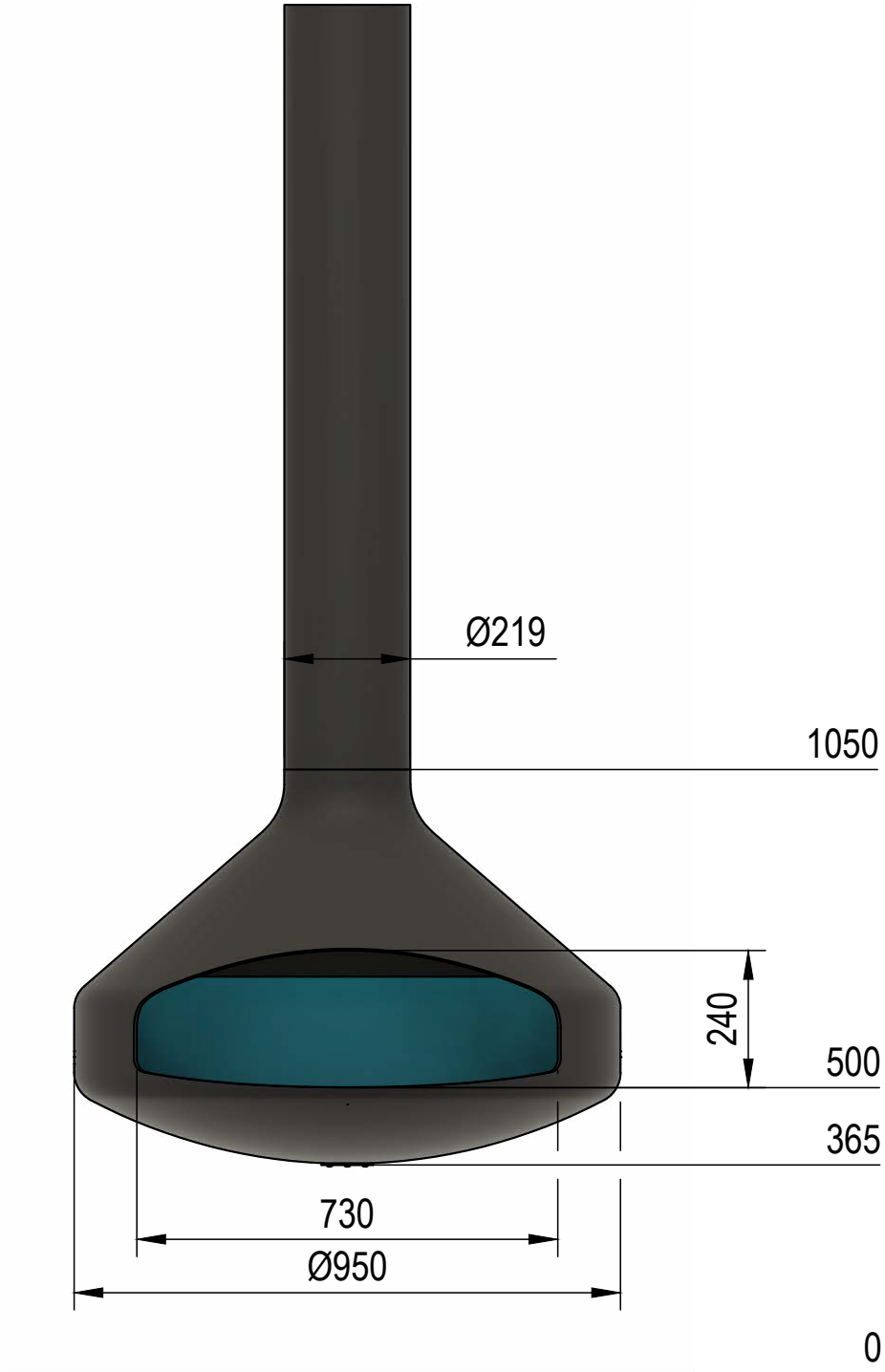

# Ergofocus

gas



## 2024 GAS

*The Ergofocus is now also available in a gas version, operated by remote control. At the touch of a button, the fire can be lit, the flame intensity and heat adjusted, or a programme set for controlled, constant, comfortable heat. This model won a Gold German Design Award on its launch.*



# Ergofocus

gas



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
690	950	950	85	16

## DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
300	300	300	0

## SAFETY DISTANCE FROM GLASS SURFACES (mm)

500
-----

## TECHNICAL SPECIFICATIONS

NATURAL GAS HEAT OUTPUT (kW)	PROPANE HEAT OUTPUT (kW)	NATURAL GAS CONSUMPTION (m <sup>3</sup> /h)	PROPANE CONSUMPTION (m <sup>3</sup> /h)
13.5	13	1.26	0.373

## ELECTRICAL POWER SUPPLY


Batteries
-----------

## FINISH

Black	White
-------	-------

# Ergofocus

gas

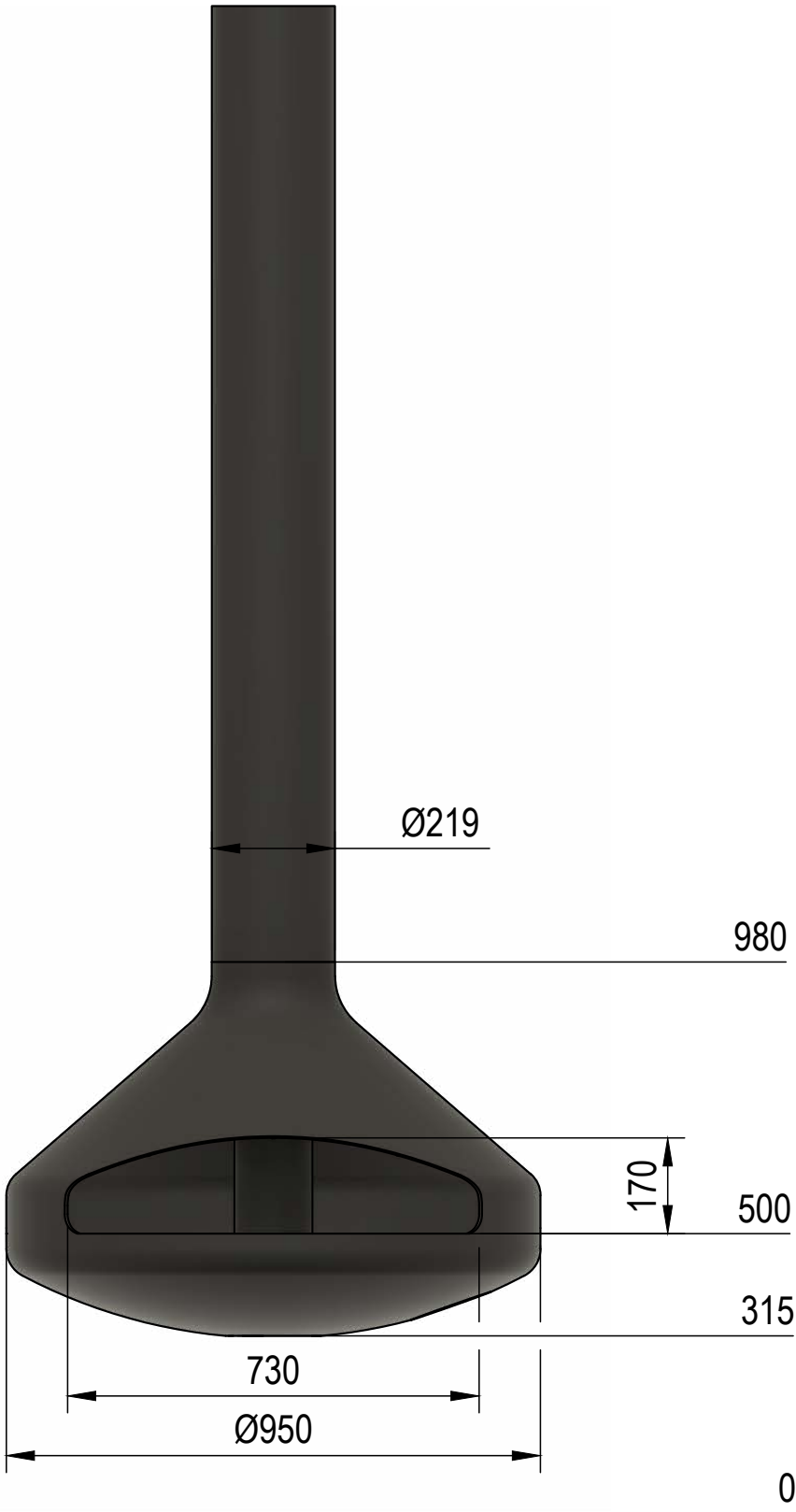

# Ergofocus


bioethanol



## 2024 BIOETHANOL

***Smokeless, with no external flue: the installation possibilities are endless!***

*Fuelled with bioethanol and fitted with a fully electronic, safe burner (made in France), this fireplace is operated by remote control. It is smokeless and does not require an external flue outlet, allowing unprecedented freedom of installation on any floor.*

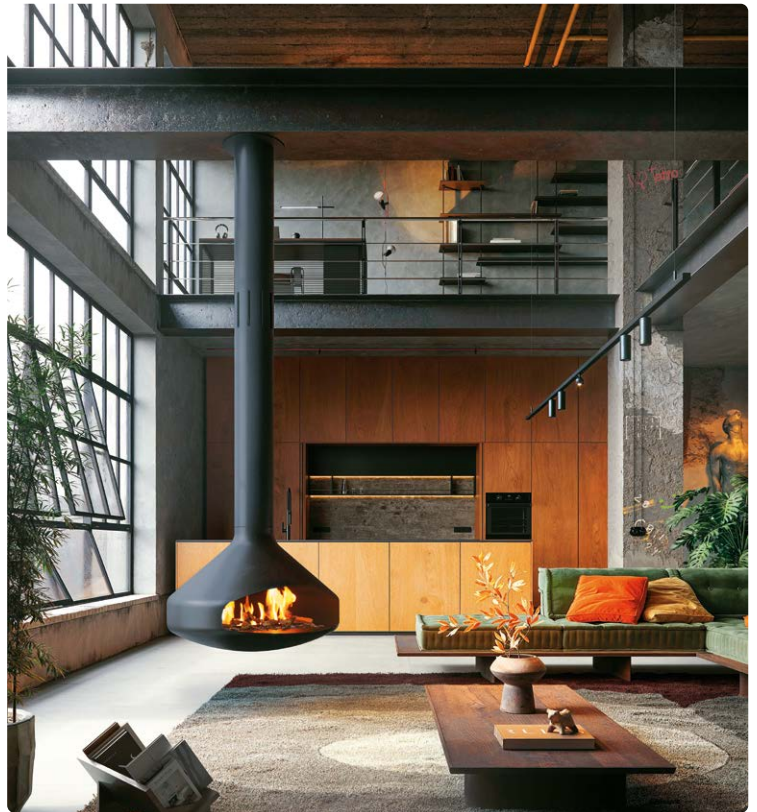

# Ergofocus

bioethanol



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
690	950	950	90	16

## SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	300	300	0

## SAFETY DISTANCE FROM GLASS SURFACES (mm)

500
-----

## WITH EXTERNAL OUTLET

HEAT OUTPUT (kW)	TANK CAPACITY (L)	AUTONOMY (h)	MIN. CEILING VOLUME (m <sup>3</sup> )
9.5	5	3	0

## WITHOUT EXTERNAL OUTLET

HEAT OUTPUT (kW)	TANK CAPACITY (L)	AUTONOMY (h)	MIN. CEILING HEIGHT (m)	MIN. ROOM VOLUME (m <sup>3</sup> )
7.5	5	4	2.50	150

## ELECTRICAL POWER SUPPLY

Batteries
-----------

## FINISH

Black	White
-------	-------



# Ergofocus

outdoor (wood-burning)



*The outdoor models are available with a black anti-corrosion finish or a rusted finish, both developed by Focus for exterior use. The rusted surface gradually changes, so the patina gains character over time.*



# Ergofocus

outdoor (wood-burning)



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
690	950	950	68	16

## SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	800	800	600

## SAFETY DISTANCE FROM GLASS SURFACES (mm)


500
-----

## FINISH

Outdoor black	Rusted steel
---------------	--------------

# Ergofocus

outdoor (wood-burning)

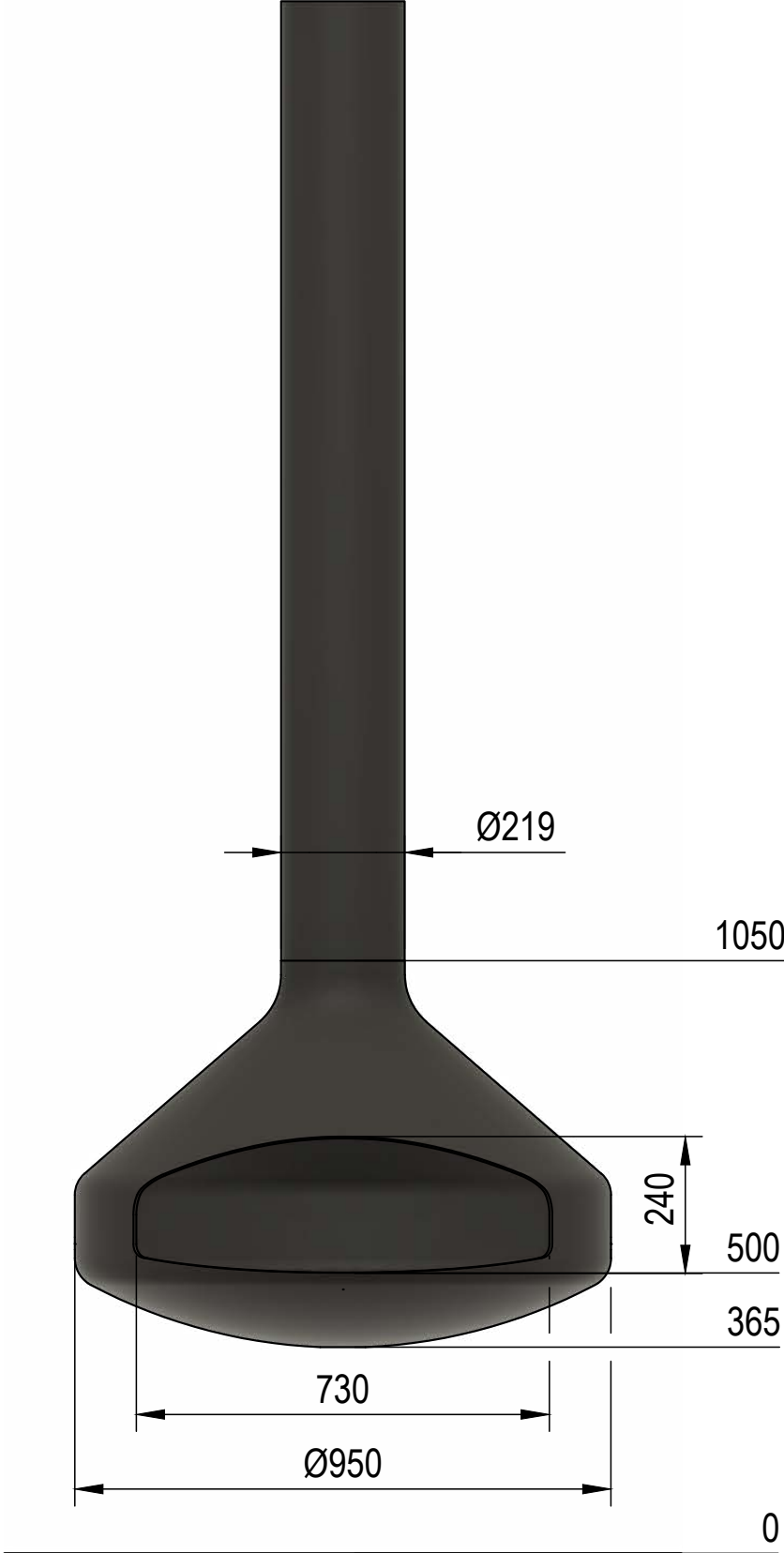


# Paxfocus

outdoor (wood-burning)



*The Paxfocus shares the same design, but while the Ergofocus is suspended, the Paxfocus is mounted to the wall.*

*The outdoor models are available with a black anti-corrosion finish or a rusted finish, both developed by Focus for exterior use. The rusted surface gradually changes, so the patina gains character over time.*

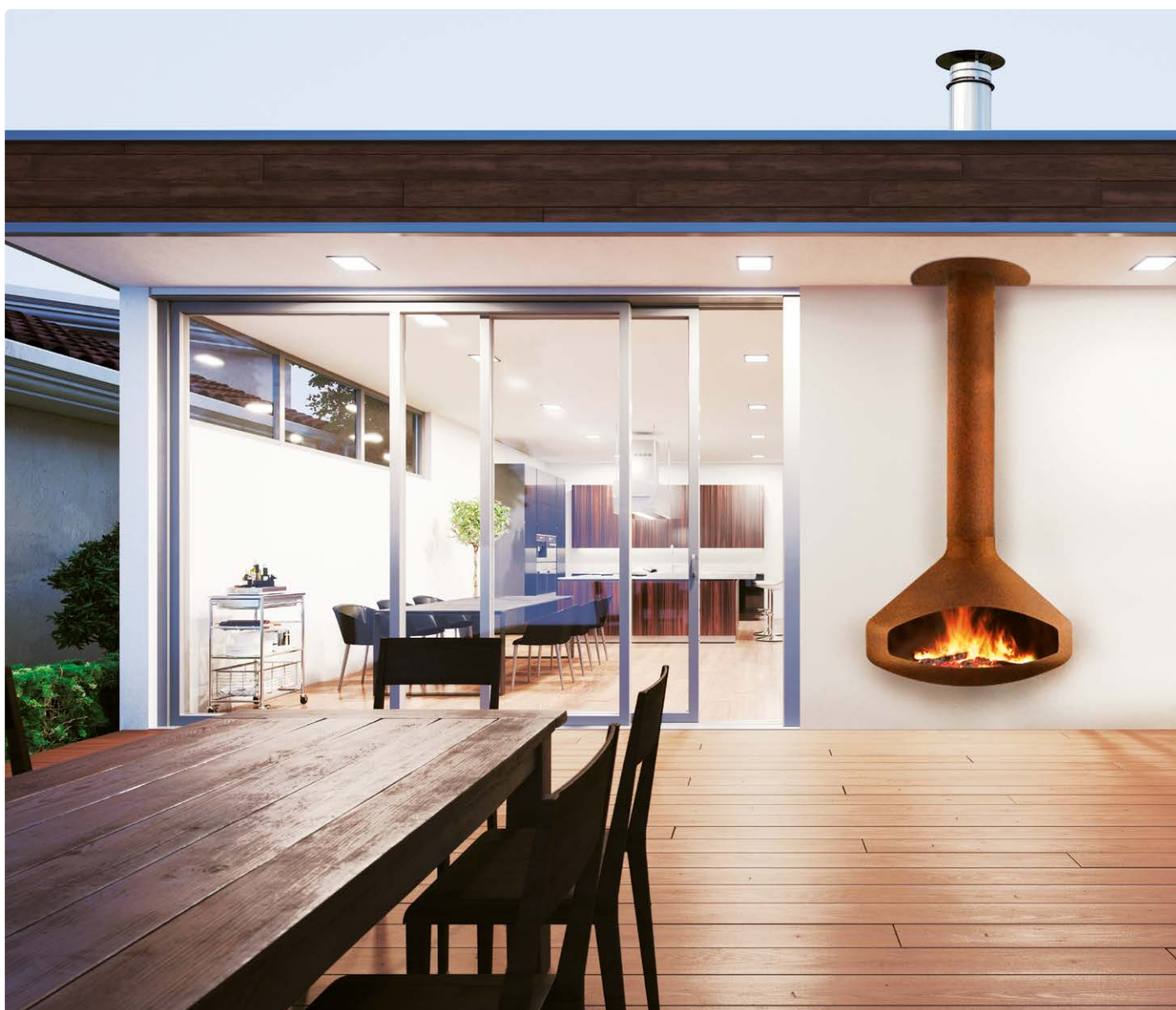

# Paxfocus

outdoor (wood-burning)



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
670	950	650	66	16

## SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	0	500	600

## SAFETY DISTANCE FROM GLASS SURFACES (mm)


500
-----

## FINISH

Outdoor black	Rusted steel
---------------	--------------

# Paxfocus

outdoor (wood-burning)

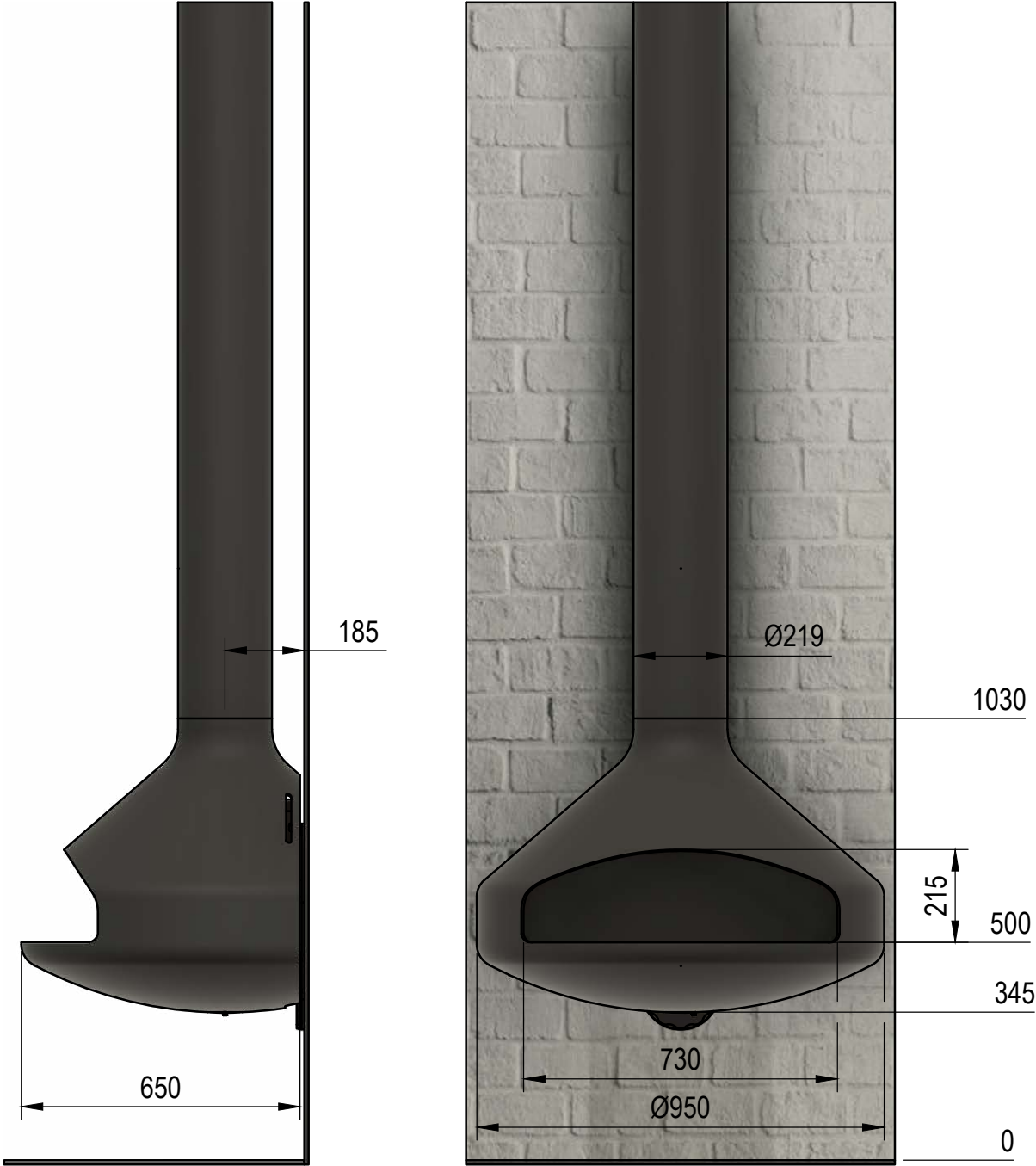



CREATE BEYOND CONVENTION

