

# Domofocus

& Magmafocus


2015

---

DESIGN: DOMINIQUE IMBERT

*The Domofocus is the winning culmination of a design quest to offer the organic lines of the iconic Gyrofocus at a more compact size.*

*While it has a smaller hearth diameter, the more rounded and larger opening enhances its welcoming smile and makes tending the fire easy.*

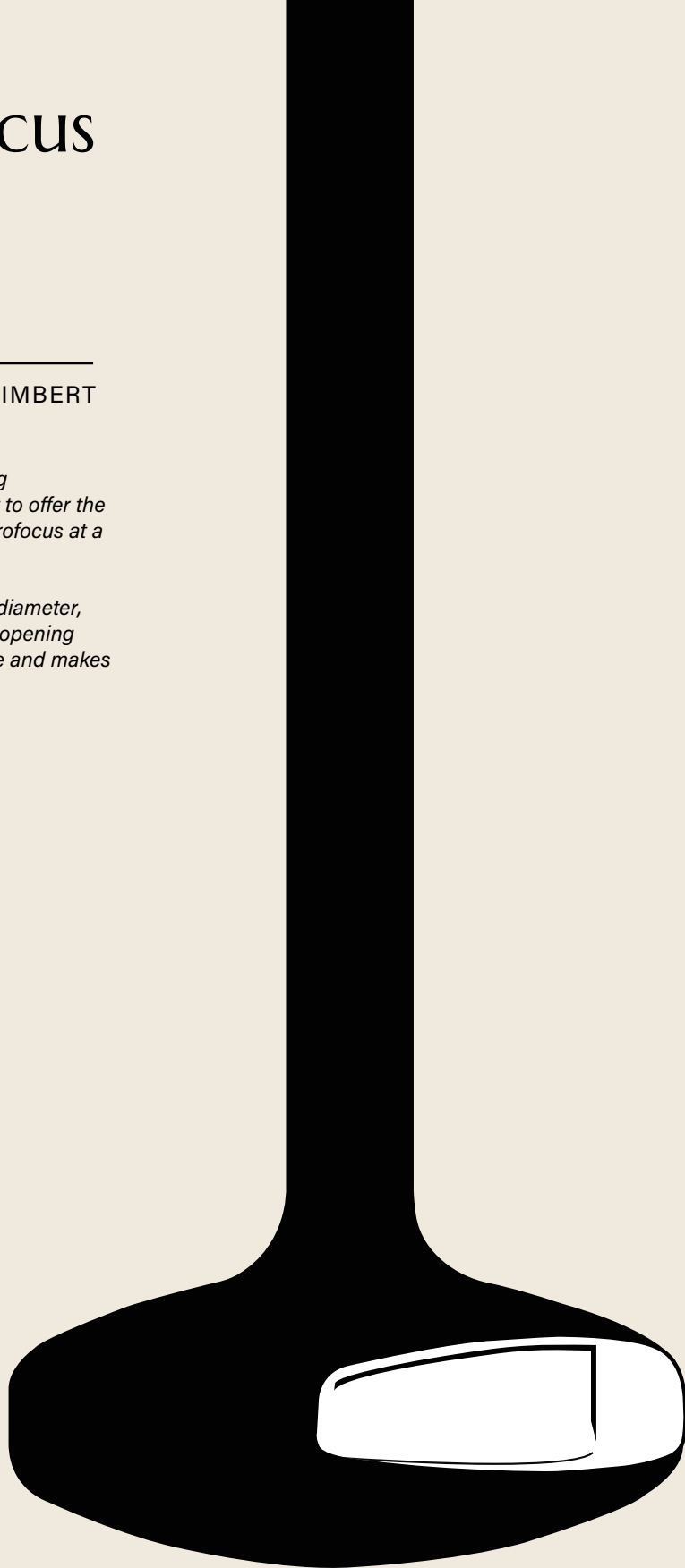

**focus**<sup>®</sup>

CREATE BEYOND CONVENTION

# Domofocus

wood-burning (Ecodesign)



## 2022 WOOD ECODESIGN

*The wood-burning Domofocus was reissued in 2022 in a closed glass-fronted version with excellent energy and environmental performance. Its two sliding glass panels offer an unobstructed view of the fire.*



# Domofocus

wood-burning (Ecodesign)



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
650	1100	1100	172	16

## SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	500	500	400

## SAFETY DISTANCE FROM GLASS SURFACES (mm)

1000
------

## TECHNICAL SPECIFICATIONS


HEAT OUTPUT (kW)	EFFICIENCY (%)	MINIMUM ROOM VOLUME (m <sup>3</sup> )
18	81	80

## FINISH

Black
-------

# Domofocus

wood-burning (Ecodesign)

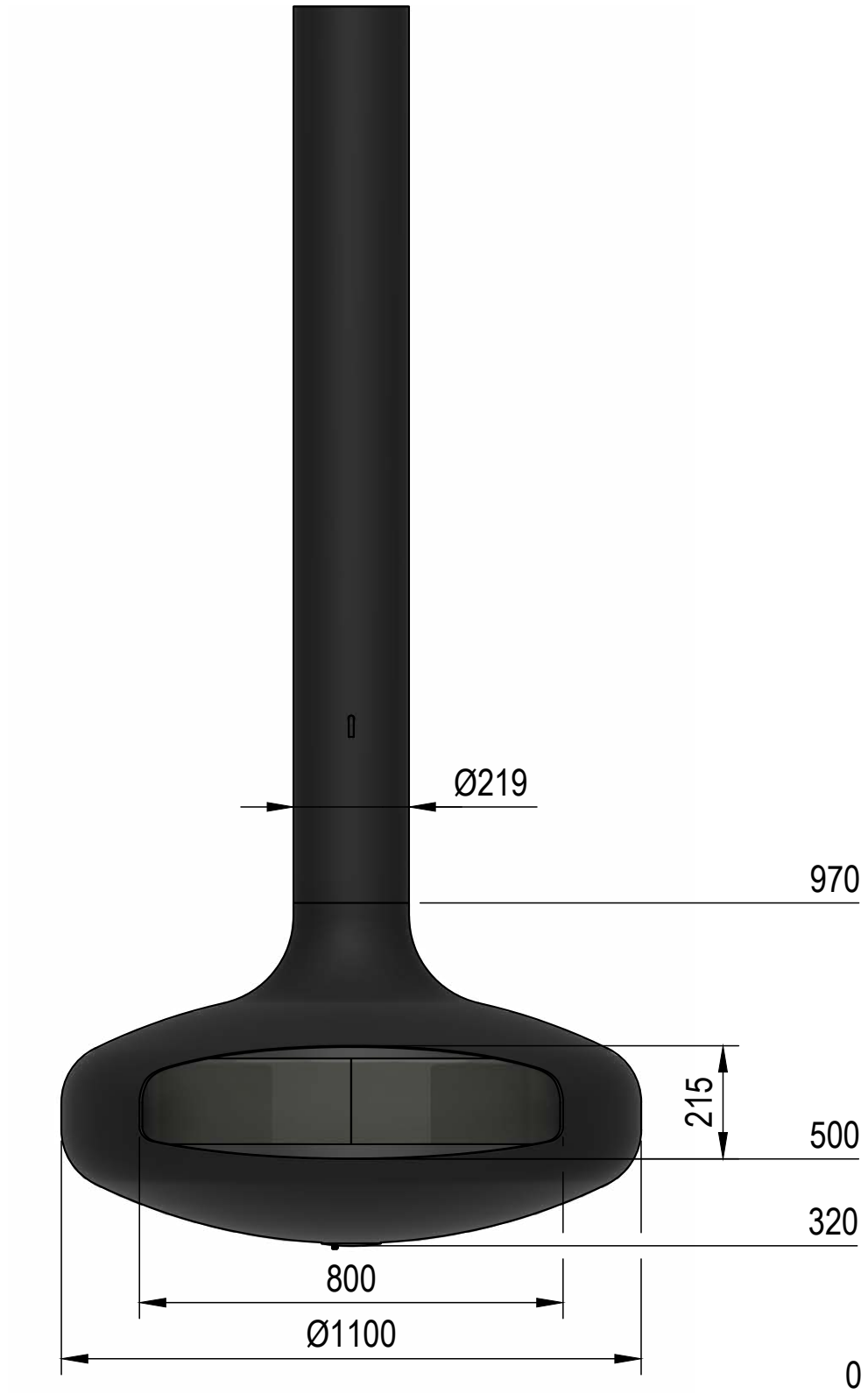

# Domofocus

bioethanol



## 2024 BIOETHANOL

***Smokeless, with no external flue:  
the installation possibilities are endless!***

*Fuelled with bioethanol and fitted with a fully electronic, safe burner (made in France), this fireplace is operated by remote control. It is smokeless and does not require an external flue outlet, allowing unprecedented freedom of installation on any floor.*



# Domofocus

bioethanol



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
650	1100	1100	100	16

## SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
800	300	300	0

## SAFETY DISTANCE FROM GLASS SURFACES (mm)

500
-----

## WITH EXTERNAL OUTLET

HEAT OUTPUT (kW)	TANK CAPACITY (L)	AUTONOMY (h)	MIN. CEILING VOLUME (m <sup>3</sup> )
9	10	7	0

## WITHOUT EXTERNAL OUTLET

HEAT OUTPUT (kW)	TANK CAPACITY (L)	AUTONOMY (h)	MIN. CEILING HEIGHT (m)	MIN. ROOM VOLUME (m <sup>3</sup> )
7	10	8	2.50	125

## ELECTRICAL POWER SUPPLY

Batteries
-----------

## FINISH


Black	White
-------	-------

# Domofocus

bioethanol



2500 minimum\*

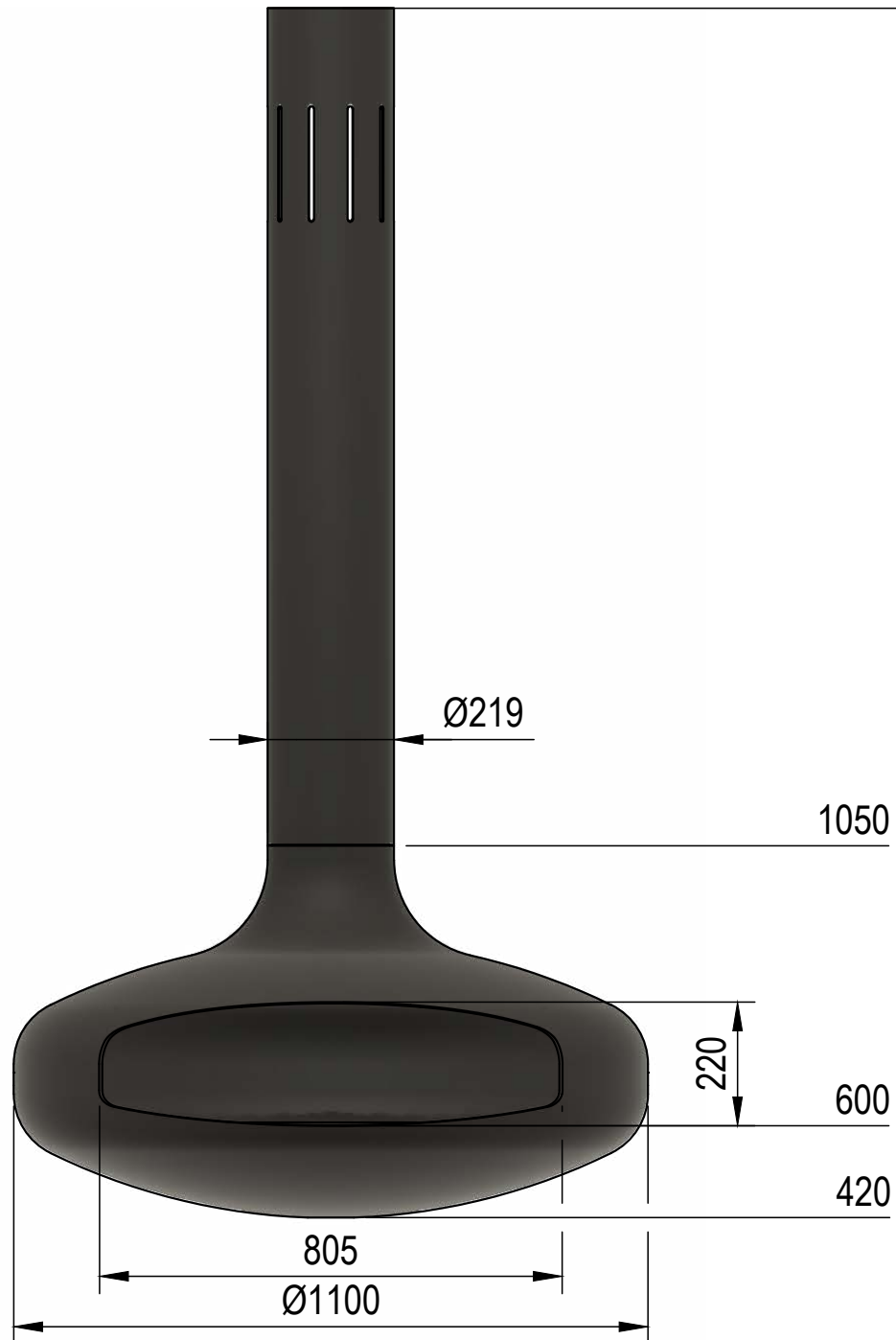

0

\*if not connected to an external outlet

# Domofocus

outdoor (wood-burning)



*The outdoor models are available with a black anti-corrosion finish or a rusted finish, both developed by Focus for exterior use. The rusted surface gradually changes, so the patina gains character over time.*



# Domofocus

outdoor (wood-burning)



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
650	1100	1100	89	16

## SAFETY DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
350	350	350	400

## SAFETY DISTANCE FROM GLASS SURFACES (mm)


500
-----

## FINISH

Outdoor black	Rusted steel
---------------	--------------

# Domofocus

outdoor (wood-burning)

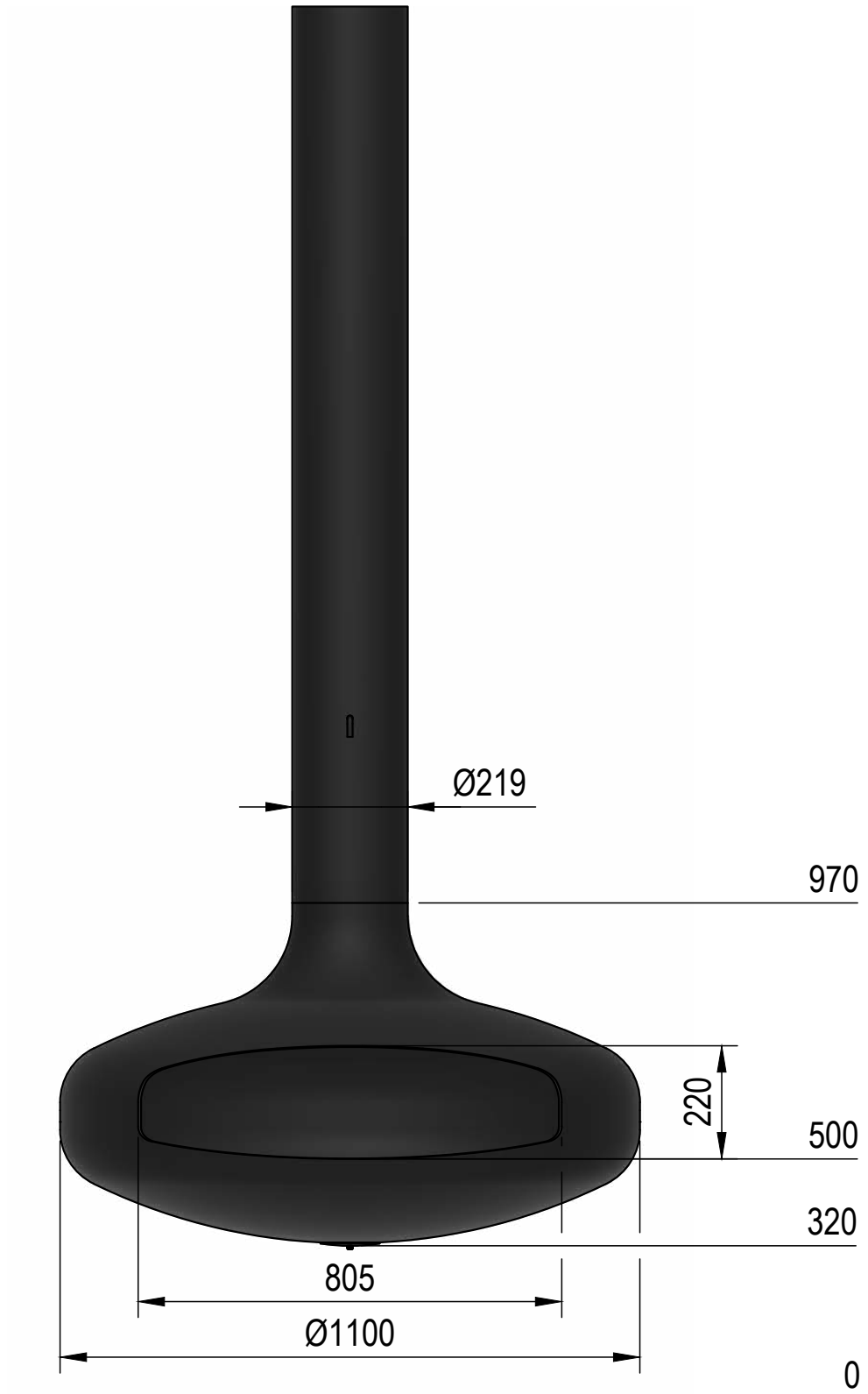


# Magmafocus

gas



*Sharing the same shape as the Domofocus but fixed on a base, the Magmafocus evokes subterranean energy reminiscent of a volcanic vent. This gas model offers exceptional ease of use, with the fire adjustable by remote control.*

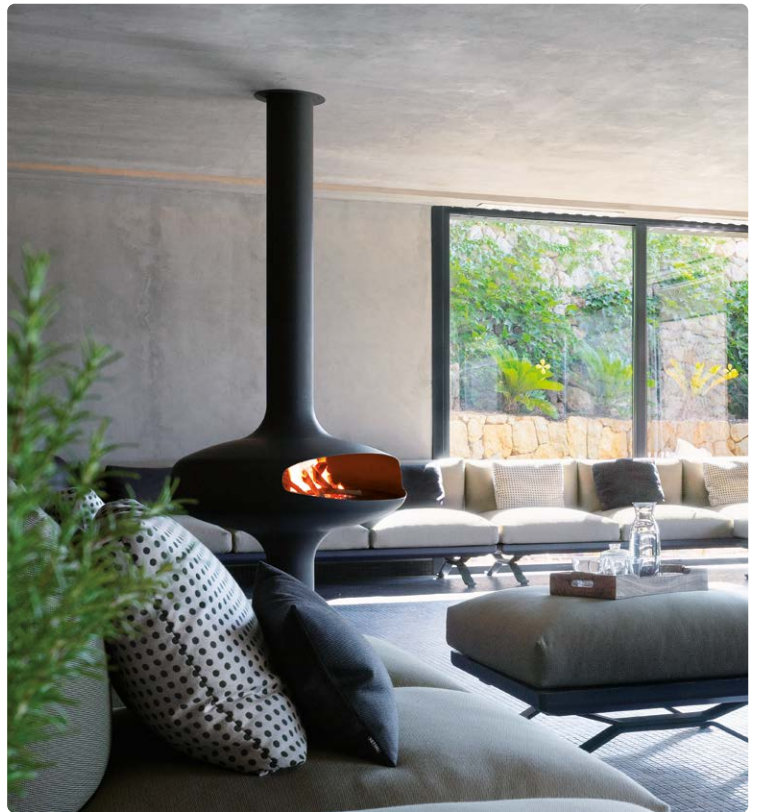

# Magmafocus

gas



## DIMENSIONS / WEIGHT

HEIGHT (mm)	WIDTH (mm)	DEPTH (mm)	FIREPLACE WEIGHT (kg)	FLUE WEIGHT (kg/linear metre)
1085	1100	1100	110	16

## DISTANCE FROM COMBUSTIBLE MATERIALS

FRONT (mm)	BACK (mm)	SIDE (mm)	FLOOR (mm)
250	250	250	0

## SAFETY DISTANCE FROM GLASS SURFACES (mm)

500
-----

## TECHNICAL SPECIFICATIONS

NATURAL GAS HEAT OUTPUT (kW)	PROPANE HEAT OUTPUT (kW)	NATURAL GAS CONSUMPTION (m <sup>3</sup> /h)	PROPANE CONSUMPTION (m <sup>3</sup> /h)
14	13.5	1.316	0.475

## ELECTRICAL POWER SUPPLY


Batteries
-----------

## FINISH

Black	White
-------	-------

# Magmafocus

gas

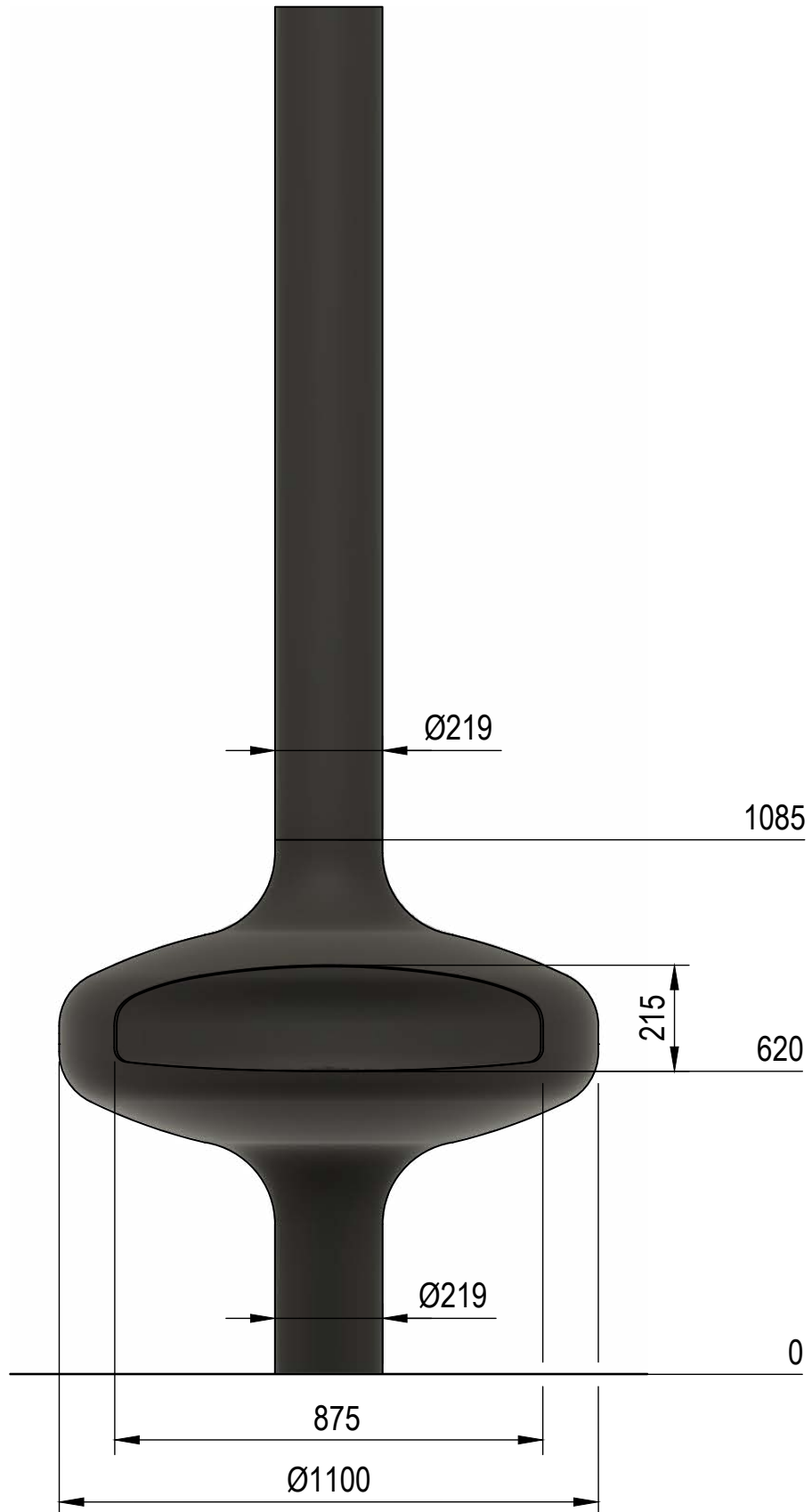

**focus**<sup>®</sup>

CREATE BEYOND CONVENTION

