



E-LINE SMART

Equipped Desk Socket Blocks—Safe, Reliable, Efficient Solutions

EAE GROUP IN NUMBERS



Since 1973

EAE Group of Companies started its journey in the electrical sector in 1973 with the establishment of EAE Elektrik. Since its founding, EAE has grown rapidly, expanding its production and areas of operation by incorporating EAE Lighting in 1983, EAE Machinery in 1996, EAE Electrotechnics in 2004, and EAE Technology in 2009.

EAE carries out its production activities in accordance with ISO 9001 Quality Management, ISO 14001 Environmental Management, ISO 14064-1 Greenhouse Gas Management System, ISO 45001 Occupational Health and Safety Management, ISO 10002 Customer Satisfaction Management, ISO 50001 Energy Management System, and ISO 27001 Information Security Management System standards.



50+
Years Experience



8
Active Factories



370.000m²
Enclosed Space



3
R&D Centers



150+
Countries Exported To

CONTENTS

E-Line Smart SM-STD-I Standard Free Type	5
SM-STD I Technical Specifications	6
E-Line Smart LUX-I Luxury Free Type	11
E-Line Smart LUX-II Luxury Standing Type	13
SM-LUX-I Luxury Free Type / SM-LUX-II Footed Type Technical Specifications	14
E-Line Smart SM-IN-I Recessed Rectangular Type	17
E-Line Smart SM-IN-I Recessed Rectangular Type Technical Specifications	18
E-Line Smart Wired STD-I	20
E-Line Smart Wired STD-I Technical Specifications	21
Standard Empty Products Table	22
E-Line Smart SM-FLEX Backbone Channel (Cable Collection System)	23
General Product Structure and Features	24
Declaration	25
Certificate	26

E-LINE SMART

High-Performance and Aesthetic Solutions





Elegant and Practical Solutions for Business Centres, Offices and Workspaces

- Fully equipped, ready-to-use products with power (grid/UPS), data, telephone, and multimedia sockets for desk work, meetings and presentations.
- Ergonomic and flexible design that can be equipped with modular type power, low current and multimedia sockets according to your personal needs and preferences.

Anodized Aluminium Body

- Anodized, smoke and black color options.
- Rich visual and functional options according to your personal needs and preferences.




E-LINE SMART SM-STD I

Standard Free Type



- It can be securely fixed with screws when needed in rectangular prism structure for desk usage or wall-mounted surface applications. It is a socket block that can be equipped with power, UPS, RJ45, RJ11 sockets; HDMI and USB charging output accessories.
- For energy sockets of various brands, as well as active and passive network components, please contact our company directly.
- Products are supplied in protective nylon bags and packaged in cardboard boxes.
- Prices include installation, internal wiring (applicable to energy sockets), and blast type plastic side covers. All cables are halogen-free. For custom cross-sections or special types, please consult our company.
- According to customer demand, it can be equipped with a minimum of 4 modules and a maximum of 18 modules.

CABLE ENTRY COVERS :

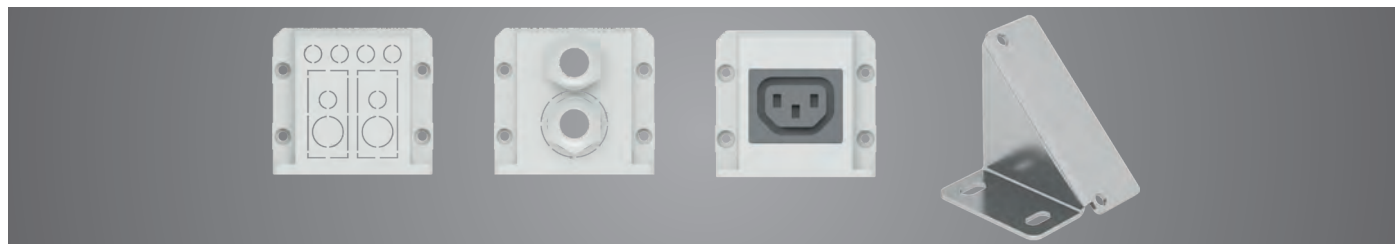

(1)
Blast Type
Ø7 Hole (6 Pieces)
Ø12 Hole (2 Pieces)

(2)
Double Coupler Type
M16x1,5 Coupler
(2 Pieces)

(3)
Pc Side Cover
(1 Pieces)

(4)
Angled Desk
Connector

- The cover type (1) is used as standard in the SM-STD I product.
- For cover types (2), (3), and (4) models, please contact our company.



E-Line Smart STD I equipped with MCB and/or RCBO

Color Options:



Smoke



Gray






Black

E-LINE SMART

Technical Specifications

E-Line Smart SM-STD I




Product Description and Visual	Color	Order Code	Energy Sockets			Active Network Components	Passive Network Components	
			SM-STD 1 Free Type	Mains (Electricity)	UPS	USB Charging (Type A+C)	Cat6 UTP RJ45	Face Plate 22,5x45
	Anodized	3404702	2	2		2	2	
		3404705	2	2	1	2	2	
		3404708	3			1		
		3404711	4			1	2	2
		3404714		4	1		2	2
		3404717	1	2			2	2
		3404720	2	3			2	2
	Smoke	3404723	2	3	1	2	2	
		3404703	2	2		2	2	
		3404706	2	2	1	2	2	
		3404709	3			1		
		3404712	4			1	2	2
		3404715		4	1		2	2
		3404718	1	2			2	2
	Black	3404721	2	3		2	2	
		3404725	2	3	1	2	2	
		3404704	2	2			2	2
		3404707	2	2	1	2	2	
		3404710	3			1		
		3404713	4			1	2	2
		3404716		4	1		2	2
3404719	1	2			2	2		
3404722	2	3			2	2		
3404726	2	3	1		2	2		

You may specify the desired color, power sockets, low-voltage sockets, and multimedia sockets according to customer requirements. Depending on the customer's request, WAGO brand interlocking or mini terminal can also be selected.



SM-STD I Product Dimensions					
Product Order Code			Dimensions (mm)		
Anodized	Smoke	Black	A	B	C
3404702	3404703	3404704	355	60	55
3404705	3404706	3404707	377,5	60	55
3404708	3404709	3404710	287,5	60	55
3404711	3404712	3404713	377,5	60	55
3404714	3404715	3404716	377,5	60	55
3404717	3404718	3404719	310	60	55
3404720	3404721	3404722	400	60	55
3404723	3404725	3404726	422,5	60	55

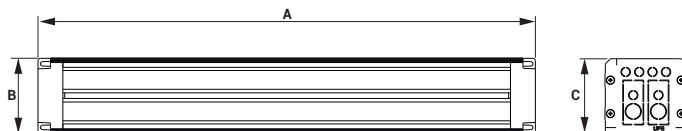

Body: Aluminium
Side Covers: PA6, V2 (Flammability Class), HF (Halogen Free)

E-LINE SMART

Accessories



Product Image	Module Quantity	Product Description	Order Code
	1	UTP CAT-6 RJ45 Keystone Jack, Data, White (Faceplate-Mounted)	1075115
		UTP CAT-6 RJ45 Keystone Jack, Data, Black (Faceplate-Mounted)	1075816
	1	Cat-3, RJ11, 4 Contact, Keystone Jack, Telephone, White (Faceplate-Mounted)	1075116
		Cat-3, RJ11, 4 Contact, Keystone Jack, Telephone, Black (Faceplate-Mounted)	1075817
	1	HDMI Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1016317
		HDMI Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1053871
	1	USB 3.0 Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1016318
		USB 3.0 Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1053875
	1	VGA Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1075135
		VGA Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1075136
	1	Lux Model Faceplate, Spring Loaded, 22,5x45mm Transparent Cover Label Space, White	1076956
	1	Lux Model Faceplate, Spring Loaded, 22,5x45mm Transparent Cover Label Space, Black	1076957
	1	Aluminum Blank Cover, 22.5x45mm, Anodised	2080641
	1	Aluminum Blank Cover, 22.5x45mm, Smoke-Coloured	2117523
	1	Aluminium Blank Cover, 22.5x45mm, Anodised Black	2080655

Product Image	Module Quantity	Product Description	Order Code
	2	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Single	1023438
	4	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Double	1063258
	6	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Triple	1063260
	2	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Single	1073627
	4	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Double	1075106
	6	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Triple	1075107
	2	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Single	1023439
	4	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Double	1063261
	6	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Triple	1063263
	1	Dual USB Charger Adapter White, 1 Port Type A, 1 Port Type C, Total Output Power Max 20W	1046296
	1	Dual USB Charger Adapter Black, 1 Port Type A, 1 Port Type C, Total Output Power Max 20W	1075818

Stainless Steel Angled Desk Connector



Description	Order Code
Stainless Steel Angled Desk Connector	2080760



Note: Should be ordered separately if needed. Compatible with the SM-STD-I model.

Please call our company for different brands.

E-LINE SMART

Technology and Art Compatible Solutions





Innovative, Aesthetic and Artistic

- Can be embedded into desks or work surfaces. Rich options for cable entry and termination.
- Product variety provided with aesthetically inconspicuous mounting legs.

Technological and Secure

- All plastic components in our products are made of PA6 raw material, halogen-free, and meet V2 flammability class according to the UL94 standard.



E-LINE SMART SM-LUX I

Luxury Free Standing Type



- It is a modular type and can be equipped with 45° angled sockets, designed with aesthetics and visual appeal in mind for desktop use, suitable for office environments, a bureau-type power strip.
- There are explosion-proof type side covers for cable entries.
- Our standard type products are manufactured with cable retaining clamps and spring terminals.
- For energy sockets of various brands, as well as active and passive network components, please contact our company directly.
- Products are supplied in protective nylon bags and packaged in cardboard boxes.
- Prices include installation, internal wiring (applicable to energy sockets), and blast type plastic side covers. All cables are halogen-free. For custom cross-sections or special types, please consult our company.



Color Options:



Smoke



Gray



Black



E-LINE SMART SM-LUX II

Luxury Standing Type



- It is a bureau-type power strip designed with aesthetics and visual appeal in mind for desktop use. With its special base design, it can be easily attached to the edge of the desk. It is equipped with modular type and 45° angled sockets, fulfilling the needs of work environments.
- There are explosive-proof type side covers for cable entries.
- Our standard type products are manufactured with cable retaining clamps and spring terminals.
- For energy sockets of various brands, as well as active and passive network components, please contact our company directly.
- Products are supplied in protective nylon bags and packaged in cardboard boxes.
- Prices include installation, internal wiring (applicable to energy sockets), and blast type plastic side covers. All cables are halogen-free. For custom cross-sections or special types, please consult our company.



Color Options:



Smoke



Gray






Black

E-LINE SMART

Technical Specifications

E-Line Smart SM-LUX I Free Type / Smart SM-LUX II Footed Type



Product Description and Visual	Color	Order Code	Energy Sockets			Active Network Components	Passive Network Components	
			SM-LUX II Footed Type	Mains (Electricity)	UPS	USB Charging (Type A+C)	Cat6 UTP RJ45	Face Plate 22,5x45
	Eloksal	3404543	2	2		2	2	
		3404546	2	2	1	2	2	
		3404549	3			1		
		3404552	4			1	2	2
		3404555		4	1		2	2
		3404558	1	2			2	2
		3404561	2	3			2	2
	Füme	3404544	2	2		2	2	
		3404547	2	2	1	2	2	
		3404550	3			1		
		3404553	4			1	2	2
		3404556		4	1		2	2
		3404559	1	2			2	2
		3404562	2	3			2	2
	Siyah	3404545	2	2		2	2	
		3404548	2	2	1	2	2	
		3404551	3			1		
		3404554	4			1	2	2
		3404557		4	1		2	2
		3404560	1	2			2	2
		3404563	2	3			2	2
3404566	2	3	1		2	2		


You may specify the desired color, power sockets, low-voltage sockets, and multimedia sockets according to customer requirements. If the "SM-LUX I Free-Standing Type" model of the above-mentioned products is required, please contact our company.



WAGO Mini Terminal Block

SM LUX II Footed Type Product Dimensions

Product Order Code			Dimensions (mm)		
Anodized	Smoke	Black	A	B	C
3404543	3404544	3404545	345	67,5	96
3404546	3404547	3404548	367,5	67,5	96
3404549	3404550	3404551	277,5	67,5	96
3404552	3404553	3404554	367,5	67,5	96
3404555	3404556	3404557	367,5	67,5	96
3404558	3404559	3404560	300	67,5	96
3404561	3404562	3404563	390	67,5	96
3404564	3404565	3404566	412,5	67,5	96

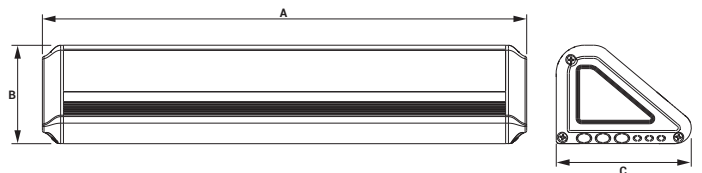

Body: Aluminium
Side Covers: PA6, V2 (Flammability Class), HF (Halogen Free)

Note: The dimensions of the SM-LUX II Floor-standing Type product are the same

E-LINE SMART

Accessories



Product Image	Module Quantity	Product Description	Order Code
	1	UTP CAT-6 RJ45 Keystone Jack, Data, White (Faceplate-Mounted)	1075115
		UTP CAT-6 RJ45 Keystone Jack, Data, Black (Faceplate-Mounted)	1075816
	1	Cat-3, RJ11, 4 Contact, Keystone Jack, Telephone, White (Faceplate-Mounted)	1075116
		Cat-3, RJ11, 4 Contact, Keystone Jack, Telephone, Black (Faceplate-Mounted)	1075817
	1	HDMI Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1016317
		HDMI Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1053871
	1	USB 3.0 Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1016318
		USB 3.0 Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1053875
	1	VGA Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1075135
		VGA Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1075136
	1	Lux Model Faceplate, Spring Loaded, 22,5x45mm Transparent Cover Label Space, White	1076956
	1	Lux Model Faceplate, Spring Loaded, 22,5x45mm Transparent Cover Label Space, Black	1076957
	1	Aluminum Blank Cover, 22.5x45mm, Anodised	2080641
	1	Aluminum Blank Cover, 22.5x45mm, Smoke-Coloured	2117523
	1	Aluminium Blank Cover, 22.5x45mm, Anodised Black	2080655

Product Image	Module Quantity	Product Description	Order Code
	2	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Single	1023438
	4	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Double	1063258
	6	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Triple	1063260
	2	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Single	1073627
	4	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Double	1075106
	6	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Triple	1075107
	2	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Single	1023439
	4	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Double	1063261
	6	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Triple	1063263
	1	Dual USB Charger Adapter White, 1 Port Type A, 1 Port Type C, Total Output Power Max 20W	1046296
	1	Dual USB Charger Adapter Black, 1 Port Type A, 1 Port Type C, Total Output Power Max 20W	1075818

Adjustable Table Connection Leg



Description	Order Code
SM-LUX II Desk Connection Kit (Gray)	2086359
SM-LUX II Desk Connection Kit (Smoke)	2086360
SM-LUX II Desk Connection Kit (Black)	2086361

Note: Should be ordered separately if needed. Compatible with the SM-LUX II model.

Desk Fastening Component



Order Code:
3048968

Note: Should be ordered separately if needed. Compatible with the SM-LUX I model.

Please call our company for different brands.



E-LINE SMART SM-IN I

Recessed Rectangular Type



- It is an office plug block designed in a recessed rectangular section, equipped with modular and 45° angled sockets, which are necessary or requested for working environments.
- The cover opens automatically with a single touch, and thanks to its special locking mechanism and brush cover structure, it can also be used while closed.
- Our standard type products are manufactured with cable holder clamps and spring terminals.
- Thanks to specially developed self-positioning side locking clips, installation is easy.
- For energy sockets of various brands, as well as active and passive network components, please contact our company directly.
- Products are supplied in protective nylon bags and packaged in cardboard boxes.
- Prices include installation, internal wiring (applicable to energy sockets), and blast type plastic side covers. All cables are halogen-free. For custom cross-sections or special types, please consult our company.



Color Options:



Smoke



Gray



Black

E-LINE SMART


Technical Specifications

Smart SM-IN I / Recessed Rectangular Type




Product Description and Visual	Color	Order Code	Energy Sockets			Active Network Components	Passive Network Components	
			SM-IN I	Mains (Electricity)	UPS	USB Charging (Type A+C)	Cat6 UTP RJ45	Face Plate 22,5x45
	Eloksal	3404616	2	2		2	2	
		3404619	2	2	1	2	2	
		3404622	3			1		
		3404625	4			1	2	2
		3404628		4	1		2	2
		3404631	1	2			2	2
		3404634	2	3			2	2
	Füme	3404637	2	3	1	2	2	
		3404617	2	2		2	2	
		3404620	2	2	1		2	2
		3404623	3			1		
		3404626	4			1	2	2
		3404629		4	1		2	2
		3404632	1	2			2	2
	Siyah	3404635	2	3		2	2	
		3404638	2	3	1	2	2	
		3404618	2	2			2	2
		3404621	2	2	1		2	2
		3404624	3			1		
		3404627	4			1	2	2
		3404630		4	1		2	2
3404633	1	2			2	2		
3404636	2	3			2	2		
3404639	2	3	1		2	2		

You may specify the desired color, power sockets, low-voltage sockets, and multimedia sockets according to customer requirements. Depending on the customer's request, WAGO brand interlocking or mini terminal can also be selected.

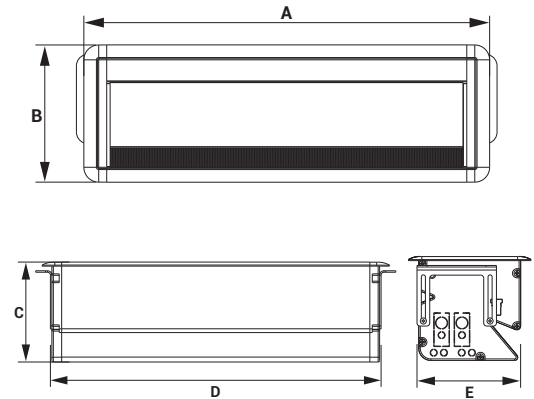

SM IN I Recessed Rectangular Type Product Dimensions									
Product Order Code			Dimensions (mm)					Cutting Dimension	
Anodized	Smoke	Black	A	B	C	D	E	F	G
3404616	3404617	3404618	357,5	120	102	337,5	100	340	102
3404619	3404620	3404621	380	120	102	360	100	362,5	102
3404622	3404623	3404624	290	120	102	270	100	272,5	102
3404625	3404626	3404627	380	120	102	360	100	362,5	102
3404628	3404629	3404630	380	120	102	360	100	362,5	102
3404631	3404632	3404633	312,5	120	102	292,5	100	295	102
3404634	3404635	3404636	402,5	120	102	382,5	100	385	102
3404637	3404638	3404639	425	120	102	405	100	407,5	102

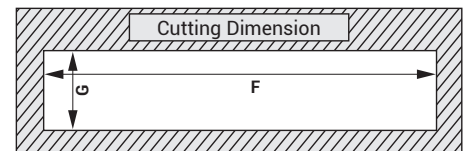

Note: Furniture should not be cut before an order is placed.

Body: Aluminium
Side Covers: PA6, V2 (Flammability Class), HF (Halogen Free)

The number indicated under the "Module" column in the table above refers to the total number of modules to be used within the product.

E-LINE SMART

Accessories



Product Image	Module Quantity	Product Description	Order Code
	1	UTP CAT-6 RJ45 Keystone Jack, Data, White (Faceplate-Mounted)	1075115
		UTP CAT-6 RJ45 Keystone Jack, Data, Black (Faceplate-Mounted)	1075816
	1	Cat-3, Rj11, 4 Contact, Keystone Jack, Telephone, White (Faceplate-Mounted)	1075116
		Cat-3, Rj11, 4 Contact, Keystone Jack, Telephone, Black (Faceplate-Mounted)	1075817
	1	HDMI Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1016317
		HDMI Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1053871
	1	USB 3.0 Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1016318
		USB 3.0 Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1053875
	1	VGA Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed White	1075135
		VGA Adapter, 22,5x45 mm Female - Female, 90 Degree, Screwed Black	1075136
	1	Lux Model Faceplate, Spring Loaded, 22,5x45mm Transparent Cover Label Space, White	1076956
	1	Lux Model Faceplate, Spring Loaded, 22,5x45mm Transparent Cover Label Space, Black	1076957
	1	Aluminum Blank Cover, 22.5x45mm, Anodised	2080641
	1	Aluminum Blank Cover, 22.5x45mm, Smoke-Coloured	2117523
	1	Aluminium Blank Cover, 22.5x45mm, Anodised Black	2080655

Product Image	Module Quantity	Product Description	Order Code
	2	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Single	1023438
	4	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Double	1063258
	6	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, White, Triple	1063260
	2	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Single	1073627
	4	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Double	1075106
	6	Modular Grounded Socket, German Standard 45x45mm, 45° Degree, Child-Proof, Black, Triple	1075107
	2	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Single	1023439
	4	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Double	1063261
	6	Modular Grounded Outlet (UPS), French Standard 45x45mm, 45° Degree, Child-Proof, Red, Triple	1063263
	1	Dual USB Charger Adapter White, 1 Port Type A, 1 Port Type C, Total Output Power Max 20W	1046296
	1	Dual USB Charger Adapter Black, 1 Port Type A, 1 Port Type C, Total Output Power Max 20W	1075818


Please call our company for different brands.

E-LINE SMART SM-STD I


Free-Standing Wired Type (3m with Plug)



- It can be securely fixed with screws when needed in rectangular prism structure for desk usage or wall-mounted surface applications.
- In desktop or wall-mounted applications, it comes as a version with a 3-meter power cable attached to the socket block.
- Equipped with mains, UPS, sockets, and USB charging output accessories.
- The built-in on/off button allows controlling the power of connected devices with a single press.
- Products are delivered in nylon bags and cardboard box packaging.
- Prices include installation, internal wiring (applicable to energy sockets), and blast type plastic side covers. All cables are halogen free.

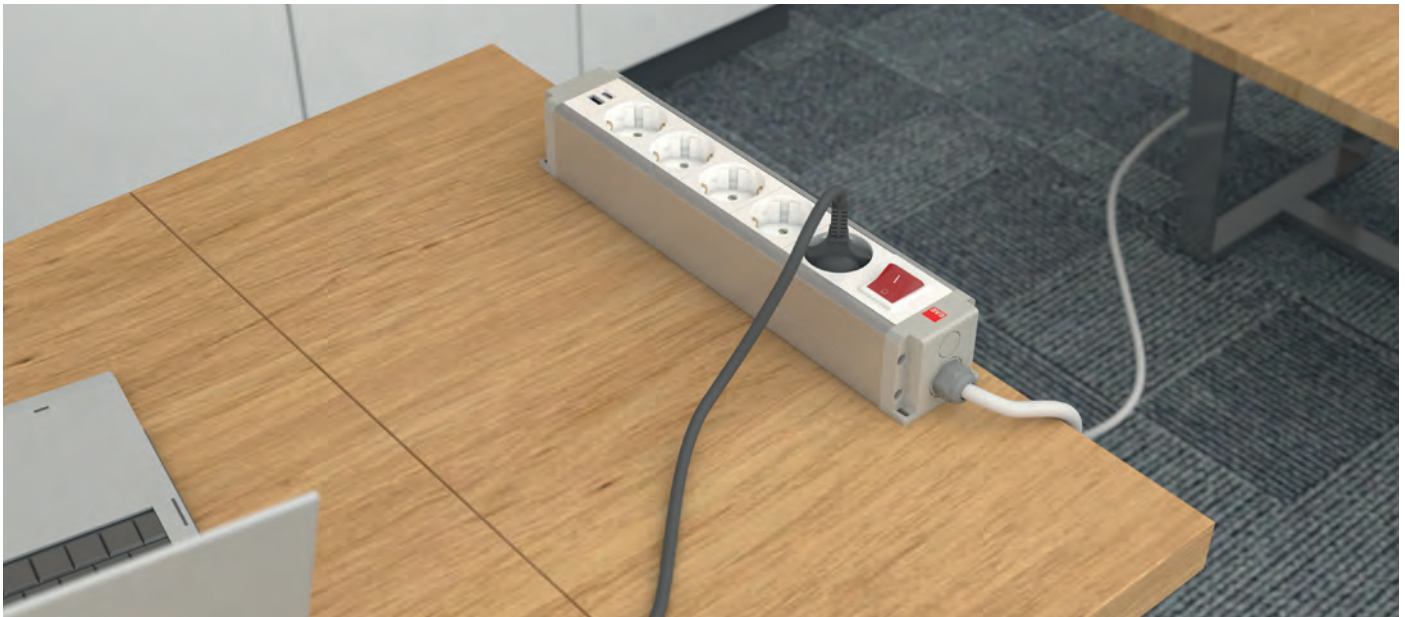

Color Options:

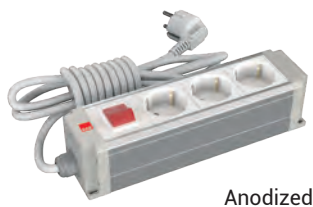





E-LINE SMART

Technical Specifications

E-Line Smart Wired SM-STD I



Product Description and Visual	Color	Order Code	Energy Sockets	Active Network Components	Switch (45x45mm)	3m Cable (Cable Cross-Section 1.5 mm ²)
			Mains (Electricity)	USB Type A+C Charging		
	Anodized	3405482	3	x	x	✓
		3405483	5	x	x	✓
		3405486	3	✓	x	✓
		3405487	5	✓	x	✓
		3409143	3	x	✓	✓
		3409150	5	x	✓	✓
		3409147	3	✓	✓	✓
		3409146	5	✓	✓	✓
	Black	3405484	3	x	x	✓
		3405485	5	x	x	✓
		3405488	3	✓	x	✓
		3405489	5	✓	x	✓
		3409145	3	x	✓	✓
		3409144	5	x	✓	✓
		3409149	3	✓	✓	✓
		3409148	5	✓	✓	✓

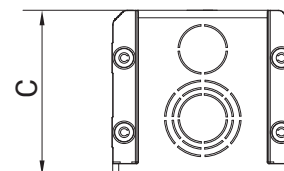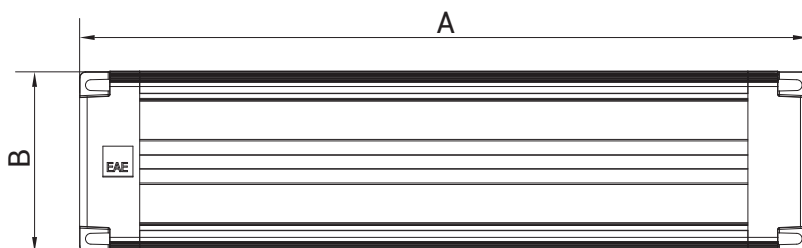

Body: Aluminium
Side Covers: PA6, V2 (Flammability Class), HF (Halogen Free)


Wired SM-STD I Product Dimensions

Product Order Code		Dimensions (mm)		
Anodized	Black	A	B	C
3405482	3405484	175	60	55
3405483	3405485	265	60	55
3405486	3405488	197,5	60	55
3405487	3405489	287,5	60	55
3409143	3409145	220	60	55
3409150	3409144	310	60	55
3409147	3409149	242,5	60	55
3409146	3409148	332,5	60	55

E-LINE SMART


Technical Specifications and Order Codes

Standard Empty Product Table

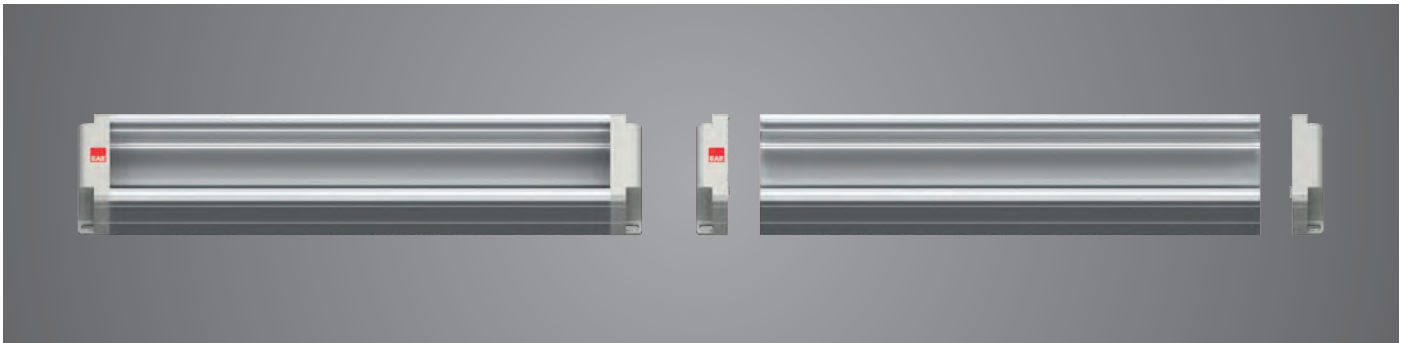

EXPLANATION

1. Assembled in 8 different sizes ranging from 6 modules to 20 modules, empty, as standard. You can also wire it yourself with the necessary number and type of socket assembly according to your needs.
2. The product is manufactured and sold as an unassembled empty case. As socket assembly and wiring, as well as electrical testing, are not conducted by us, our company will not be responsible for any malfunction in case of such issues.
3. "Halogen free" feature PA6 side panels, suitable for the body structure and equipped with knock-out holes for cable entries, are provided as standard with the product. Additionally, the product includes screw-type cable retaining clips inside the body and a grounding terminal mounted on the body.
4. In addition to the standard sizes listed, custom manufacturing in different sizes can be provided upon request and need. Please contact our company for further information.
5. The structure and dimensions are suitable for the assembly of modular type 45x45 mm or 22.5x45 mm mains and UPS power sockets, as well as telephone, data, USB, HDMI, and VGA multimedia sockets. However, it's important to note that the socket height and fitting details may vary and may not be compatible with all brands. Please contact our company before placing an order to discuss this matter.

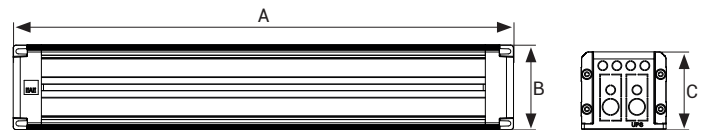

E-Line Smart SM-STD B / Standard Empty Type

Product Description and Visual	Color	Order Code	Capacity (Module)	Product Dimensions		
				A	B	C
	Anodized	3178192	6	175	60	55
		3178193	8	220	60	55
		3178194	10	265	60	55
		3178195	12	310	60	55
		3178196	14	355	60	55
		3178197	16	400	60	55
		3178198	18	445	60	55
		3178199	20	490	60	55
	Smoke	3290894	6	175	60	55
		3290895	8	220	60	55
		3290890	10	265	60	55
		3290896	12	310	60	55
		3290891	14	355	60	55
		3290897	16	400	60	55
		3290892	18	445	60	55
		3290893	20	490	60	55
	Black	3179219	6	175	60	55
		3179220	8	220	60	55
		3179221	10	265	60	55
		3179222	12	310	60	55
		3179223	14	355	60	55
		3179224	16	400	60	55
		3179225	18	445	60	55
		3179226	20	490	60	55

E-LINE SMART

SM-Flex Spine Tray and Order Codes



SM-FLEX Spine Tray		
Description	Product Order Code	
	Gray	Smoke
SM-FLEX Spine Tray Cable Organizer	5000363	5001022


- For routing power, low-voltage, and multimedia cables from the floor to desks or workspaces;
- Flexible and aesthetic solution
- PA6 material, V2 (Flame Retardant Class), HF (Halogen Free) feature manufactured with PA6 material
- Standard Size = 750 mm



(Gray)



(Smoke)

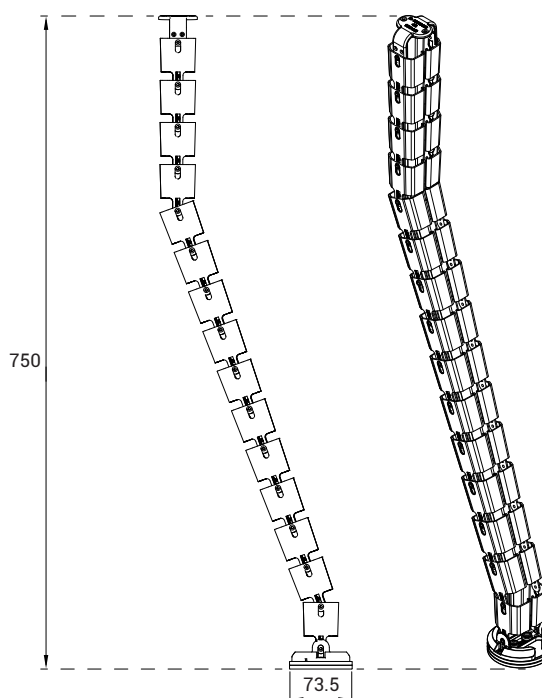

1. The body is made of aluminum material and painted with alternatives of Anodized or electrostatic powder coating system in smoke and black colors.
2. Side plastic covers are made of (PA6) material, providing compliance with "halogen-free" and meeting the 960°C hot wire (glow wire) test conditions according to IEC 60965 standard, classified as "V2" flame resistance class according to UL94 standard.
3. Standard free-standing products can be fixed to the table with appropriate feet already attached when necessary.
4. Standard free-standing products can be screwed into the table inside and/or underneath through the screw holes on the side covers when necessary.
5. Recessed type products' covers are opened and closed with a push-lock (push-open - push-close) system, and the covers can be opened up to a maximum of 90° to prevent breakage. The cable entry and exit points of the cover are brush structured, and the brushes are made of PA6 material. When any type of plug or adapter is plugged into the sockets, the covers can easily close. The product is designed to be a maximum of 2mm above the table surface when the cover is closed.
6. Standard products that can be fixed to the table are positioned at a certain angle for ease of use, and there is a movable cover plate on the back of the product that covers and protects the cable entry and exit points in a body-compliant manner.
7. The product contains terminal connection apparatus both inside and in a separate compartment, featuring screwless terminal blocks for each conductor with a push-in type connection. Additionally, this terminal apparatus is equipped with a cable compression clip to withstand pulling and tensile loads on the cables.
8. The connection of the power sockets mounted on the product is made with H07Z1-K type cable with a cross-section of 2.5 mm² or optionally 1.5 mm², and it is equipped with terminals capable of carrying at least 16A load for screwless push-in type connections, separately for UPS and Mains circuits.
9. The grounding contact screw and grounding terminal, fixed to the Aluminum body of the product, are connected with H07Z1-K type cable with a cross-section of 2.5 mm² to ensure body protection.
10. The socket mounting section is integrated with the body and designed to accommodate power sockets of any brand, as well as universal and modular type sockets, with dimensions of 45x45 mm (2 modules) for power sockets and 45x22.5 mm (1 module) for low-current and multimedia socket mounting.
11. The mains and UPS sockets are 250V AC, 16A, with a 45° angled design and a snap-in structure. The sockets used in the mains circuit are "white" in color and grounded according to the German standard, while the sockets used in the UPS circuit are "red" in color and grounded according to the French standard.
12. For data cable connections, spring-loaded and labeled "face plates" suitable for Cat-6 UTP keystone jack structure are used.
13. For telephone cable connections, spring-loaded and labeled "face plates" suitable for Cat-3 keystone jack structure are used.
14. The socket mounting section is also designed to accommodate various standard and modular USB chargers, USB adapters, VGA adapters, HDMI adapters, etc. (45x45 and/or 45x22.5 mm), and it can be used with products of any brand.
15. Between the strong and weak current sockets inside the product, as well as after the last socket, blind covers compatible with the body of 45x22.5 mm (1 module) size are used before the termination cover.
16. For cable outlets on the desk, flexible and "halogen-free" cable organizer and protective plastic spine channels are used.

CE DECLARATION OF CONFORMITY

Product Group E-LINE SMART Modular Power Outlet Blocks

Manufacturer EAE Elektrik Asansor End. İnşaat San. ve Tic. A.S.
Akcaburgaz Mahallesi, 3114. Sokak,
No:10, 34522 Esenyurt - İstanbul

We confirm the compliance of the product or product group specified above, which is produced in EAE Facilities, with the standards and regulations listed below.

Standard:

IEC 60670-1

Boxes and enclosures for electrical accessories for household and similar fixed electrical installations - Part 1: General requirements

CE - Directive:

Low Voltage Directive 2014/35/EU

Technical Documentation Preparation Authority

EAE Elektrik Asansor End. İnşaat San. ve Tic. A.S.
Akcaburgaz Mahallesi, 3114. Sokak, No:10, 34522 Esenyurt - İstanbul

Mustafa AKCELIK

Date

08/03/2025

Document Signing Authority

Elif Gamze KAYA OK
Deputy General Manager



Zertifikat

Certificate



Zertifikat Nr. Certificate No.
R 60169731

Blatt Sheet
0001

Ihr Zeichen Client Reference

Unser Zeichen Our Reference

Ausstellungsdatum

Date of Issue

0001-I.Ü.-TR23MV7U 001

03.08.2023

(day/mo/yr)

Genehmigungsinhaber License Holder

EAE ELEKTRİK ASANSÖR END.İNŞAAT SAN.
VE TİC.A.Ş.
Makine İhtisas Organize Sanayi
Bölgesi 6.cadde No:6 Demirciler Köyü
41455 Kocaeli
Türkiye

Fertigungsstätte Manufacturing Plant

EAE ELEKTRİK ASANSÖR END.İNŞAAT SAN.
VE TİC.A.Ş.
Makine İhtisas Organize Sanayi
Bölgesi 6.cadde No:6 Demirciler Köyü
41455 Kocaeli
Türkiye

Prüfzeichen Test Mark



Type Approved
Safety
Regular Production
Surveillance

www.tuv.com
ID 1111267823

Geprüft nach Tested acc. to
IEC 60670-1:2015

Zertifiziertes Produkt (Geräteidentifikation)

Certified Product (Product Identification)

Lizenzentgelte - Einheit

License Fee - Unit

Connecting box without fixing (Empty boxes for electrical accessories-
Flush Type)

Type Designation: SM-A-CDE	5
A: IN1, DEC5	1
C: F, G, S	1
D: 06M, 07M, 08M, 09M, 10M, 11M, 12M, 13M 14M, 15M, 16M, 17M, 18M, 19M, 20M	1
E: 1, 2, 3, 4, 5, 6, 7, 8, 9, 10, 11, 12, 13, 14, 15, 16 17, 18, 19, 20, 21, 22, 23, 24	1

Trademark: EAE

See test report for further details
This certificate replaces R 60157750 0001.

9

Dem Zertifikat liegt unsere Prüf- und Zertifizierungsordnung zugrunde und es bestätigt die Konformität des Produktes mit den oben genannten Standards und Prüfgrundlagen. Zusätzliche Anforderungen in Ländern, in denen das Produkt in Verkehr gebracht werden soll, müssen zusätzlich betrachtet werden. Die Herstellung des zertifizierten Produktes wird überwacht. This certificate is based on our Testing and Certification Regulation and states the conformity of the product with the standards and testing requirements as indicated above. Any additional requirements in countries where the product is going to be marketed have to be considered additionally. The manufacturing of the certified product is subject to surveillance.



Zertifizierungsstelle



Paulus Hou

TÜV Rheinland LGA Products GmbH, Tillystraße 2, 90431 Nürnberg

http://www.tuv.com/safety E-mail: markcheck@tuv.com
Fax: +49 221 806-3935

Zertifikat

Certificate



Zertifikat Nr. Certificate No.
R 60169751

Blatt Sheet
0001

Ihr Zeichen Client Reference

Unser Zeichen Our Reference

Ausstellungsdatum

Date of Issue

0001-I.Ü.-TR233YJ3 001

03.08.2023

(day/mo/yr)

Genehmigungsinhaber License Holder

EAE ELEKTRİK ASANSÖR END.İNŞAAT SAN.
VE TİC.A.Ş.
Makine İhtisas Organize Sanayi
Bölgesi 6.cadde No:6 Demirciler Köyü
41455 Kocaeli
Türkiye

Fertigungsstätte Manufacturing Plant

EAE ELEKTRİK ASANSÖR END.İNŞAAT SAN.
VE TİC.A.Ş.
Makine İhtisas Organize Sanayi
Bölgesi 6.cadde No:6 Demirciler Köyü
41455 Kocaeli
Türkiye

Prüfzeichen Test Mark



Type Approved
Safety
Regular Production
Surveillance

www.tuv.com
ID 1111267868

Geprüft nach Tested acc. to
IEC 60670-1:2015

Zertifiziertes Produkt (Geräteidentifikation)

Certified Product (Product Identification)

Lizenzentgelte - Einheit

License Fee - Unit

Connecting box without fixing (Empty boxes for electrical accessories-Surface Type)

Type Designation:	SM-A-CDE	5
A:	STD1, STD2, LUX1, LUX2, STDB DEC1, DEC2 DEC6, DEC7	1
C:	F, G, S	1
D:	06M, 07M, 08M, 09M, 10M, 11M, 12M, 13M, 14M 15M, 16M, 17M, 18M, 19M, 20M	1
E:	1, 2, 3, 4, 5, 6, 7, 8, 9, 10, 11, 12, 13, 14, 15 16, 17, 18, 19, 20, 21, 22, 23, 24	1

Trademark: EAE
See test report for further details.
This certificate replaces R 60157751 0001.

9

Dem Zertifikat liegt unsere Prüf- und Zertifizierungsordnung zugrunde und es bestätigt die Konformität des Produktes mit den oben genannten Standards und Prüfgrundlagen. Zusätzliche Anforderungen in Ländern, in denen das Produkt in Verkehr gebracht werden soll, müssen zusätzlich betrachtet werden. Die Herstellung des zertifizierten Produktes wird überwacht. This certificate is based on our Testing and Certification Regulation and states the conformity of the product with the standards and testing requirements as indicated above. Any additional requirements in countries where the product is going to be marketed have to be considered additionally. The manufacturing of the certified product is subject to surveillance.



 
Zertifizierungsstelle



Paulus Hou

TÜV Rheinland LGA Products GmbH, Tillystraße 2, 90431 Nürnberg

http://www.tuv.com/safety E-mail: markcheck@tuv.com
Fax: +49 221 806-3935




A large grid area for taking notes, consisting of a 20x30 grid of small squares.

SUSTAINABLE FUTURE


Sustainability Management at EAE Elektrik



 As part of our goal to support sustainable development and green transformation, measuring, evaluating, and managing all economic, environmental, and social impacts resulting from our sustainability practices is a key governance priority for EAE Elektrik. We act with great care in analyzing, monitoring, and managing the economic, environmental, and social impacts and risks that arise throughout our value chain in both our national and global operations.




Busbar Systems

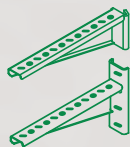

Support Systems



Cable Tray Systems

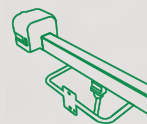

Trolley Busbar Systems



Fit-Out Solutions

"We are working together with all our stakeholders to develop the electrical technologies that will build the future."

You can visit our sustainability website at sustainability.eaeelectric.com



#FutureTogether

EAE Elektrik
Head Office

Akcaburgaz Mahallesi,
3114. Sokak, No: 10 34522
Esenyurt - Istanbul - Turkiye
Tel: +90 (212) 866 20 00
Fax: +90 (212) 886 24 20

EAE DL 4 Factory
Busbar 2

Organize Sanayi Bolgesi Mahallesi,
6. Cadde, No: 14/10, 41455
Dilovasi - Kocaeli - Turkiye
Tel: +90 (262) 999 05 55
Fax: +90 (262) 502 01 45



Please visit our website for the updated
version of our catalogues.
www.eaelectric.com



Catalogue 31 - En. / Rev. 11 1000 Pcs. 22/04/2026
N.G.

EAE has full right to make any revisions or changes on this catalogue without any prior notice.