

Sauna Product Options

A comprehensive list of all Thermory Sauna Products



DIY SAUNA KITS

SPECIES:

Spruce

USE:

Interior
Exterior

Natural Barrel Sauna No60
Photo: ThisXLife, Bela Fishbeyn
Fairview, North Carolina



Natural Barrel Sauna No60
Photo: ThisXLife, Bela Fishbeyn
Fairview, North Carolina

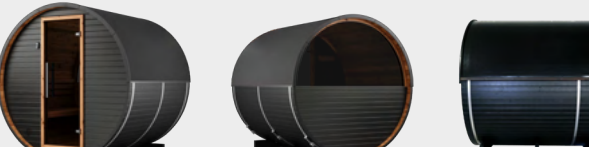
NATURAL BARREL

	MODEL	OCCUPANCY	WINDOW	TOTAL LENGTH		OUTSIDE DIAMETER	INSIDE DIAMETER	BENCH L x W	WINDOW SIZE	PORCH LENGTH	WALL/BOARD THICKNESS	VOLUME
	Nº60	4	Window	7.33'		7.52'	7.25'	5' x 2.08'	7' x 3.5'	1.58'	1.57"	212 CU. FT.
	Nº61	4	No Window	7.33'		7.52'	7.25'	5' x 2.08'	-	1.58'	1.57"	212 CU. FT.
	Nº62	6	Window	7.33'		7.52'	7.25'	6.5' x 2.08	7' x 3.5'	No Porch	1.57"	265 CU. FT.
	Nº63	6	No Window	7.33'		7.52'	7.25'	6.5' x 2.08	-	No Porch	1.57"	265 CU. FT.
	Nº50	6	Window	7.33'		6.29'	6.06'	6.38' x 1.63'	5.83' x 3'	No Porch	1.57"	199.5 CU. FT.
	Nº51	6	No Window	7.33'		6.29'	6.06'	6.38' x 1.63'	-	No Porch	1.57"	199.5 CU. FT.

NATURAL BARREL

	MODEL	OCCUPANCY	WINDOW	TOTAL LENGTH			OUTSIDE DIAMETER	INSIDE DIAMETER	BENCH L x W	WINDOW SIZE	PORCH LENGTH	WALL/BOARD THICKNESS	VOLUME
	Nº52	4	Window	5.9'			6.29'	6.06'	4.95' x 1.63'	5.83' x 3'	No Porch	1.57"	154.3 CU. FT.
	Nº53	4	No Window	5.9'			6.29'	6.06'	4.95' x 1.63'	-	No Porch	1.57"	154.3 CU. FT.
	Nº54	2	Window	4.88'			6.29'	6.06'	3.94' x 1.63'	5.83' x 3'	No Porch	1.57"	124.3 CU. FT.
	Nº55	2	No Window	4.88'			6.29'	6.06'	3.94' x 1.63'	-	No Porch	1.57"	124.3 CU. FT.

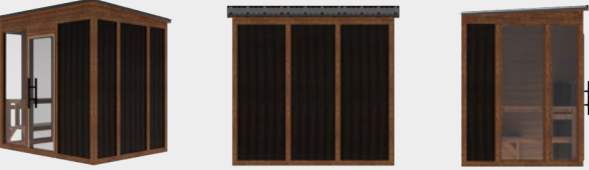
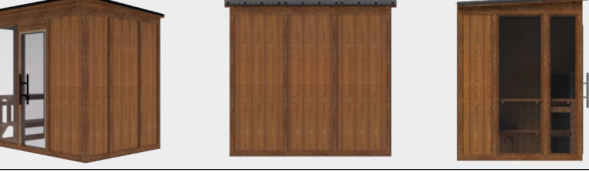
IGNITE BARREL

	MODEL	OCCUPANCY	WINDOW	TOTAL LENGTH			OUTSIDE DIAMETER	INSIDE DIAMETER	BENCH L x W	WINDOW SIZE	PORCH LENGTH	WALL/BOARD THICKNESS	VOLUME
	Nº60	4	Window	7.33'			7.52'	7.25'	5' x 2.08'	7' x 3.5'	1.58'	1.57"	212 CU. FT.
	Nº62	6	Window	7.33'			7.52'	7.25'	6.5' x 2.08	7' x 3.5'	No Porch	1.57"	265 CU. FT.
	Nº52	4	Window	5.9'			6.29'	6.06'	4.95' x 1.63'	5.83' x 3'	No Porch	1.57"	154.3 CU. FT.
	Nº54	2	Window	4.88'			6.29'	6.06'	3.94' x 1.63'	5.83' x 3'	No Porch	1.57"	124.3 CU. FT.

SAUNA SQUARES

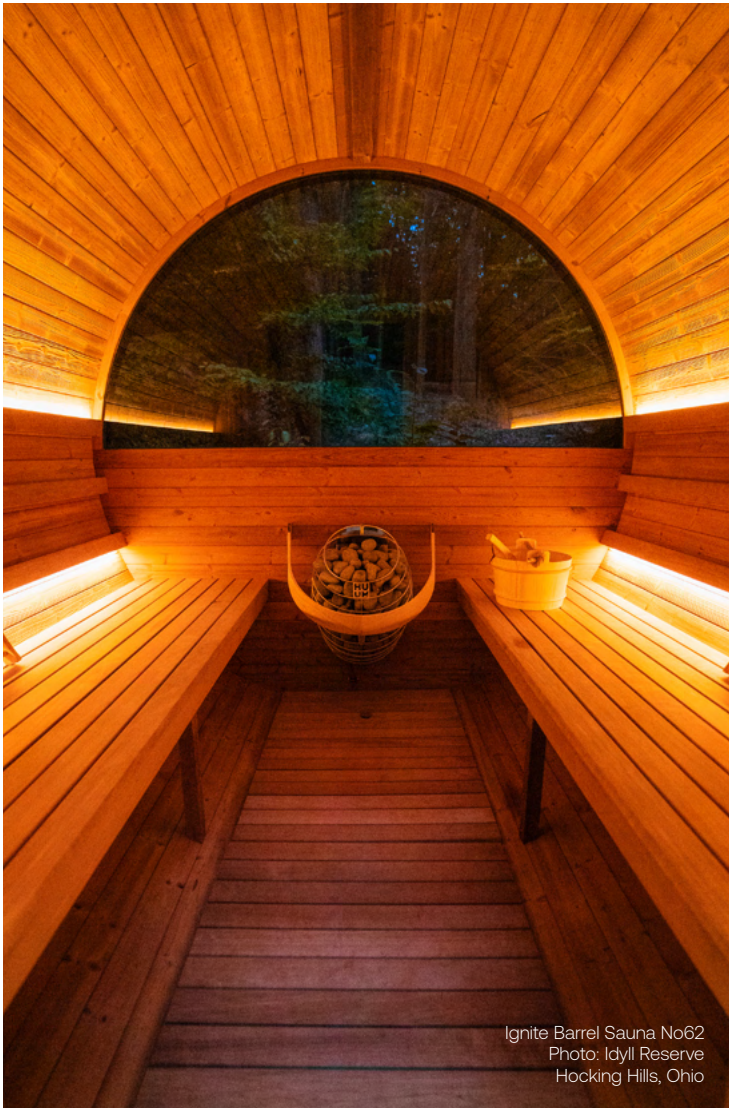
			MODEL	OCCUPANCY	WINDOW	TOTAL LENGTH		TOTAL WIDTH	TOTAL HEIGHT	BACK BENCH SIDE BENCH L x W	WINDOW SIZE	PORCH LENGTH	WALL/BOARD THICKNESS	VOLUME
			N°40	6	Window	8.24'		6.9'	7.21'	Back 6.5' x 1.61' Side 4.3' x 1.61'	6.3' X 3.2'	1.61'	1.57"	241 CU. FT.
			N°41	6	No Window	8.24'		6.9'	7.21'	Back 6.5' x 1.61' Side 4.3' x 1.61'	-	1.61'	1.57"	241 CU. FT.
			N°42	4	Window	6.93'		6.9'	7.28'	Back 6.5' x 1.61' Side 2.9' x 1.61'	6.3' X 3.2'	1.61'	1.57"	191 CU. FT.
			N°43	4	No Window	6.93'		6.9'	7.28'	Back 6.5' x 1.61' Side 2.9' x 1.61'	-	1.61'	1.57"	191 CU. FT.
			N°45	1-2	No Window	4.63'		4.4'	7.28'	Back 3.9' x 1.67' Side 2.0' x 0.9'	-	No Porch	1.57"	98 CU. FT.

MOD 6
POWERED BY SUPERIOR SAUNA

			MODEL	OCCUPANCY	WINDOW	TOTAL LENGTH		TOTAL WIDTH	TOTAL HEIGHT	EXTERIOR	INTERIOR	BENCH	CEILING	DOOR
			MODERN - SOCIAL	6-8	Corner Windows	8.25'		6.25'	8.04'	Ignite Spruce 1 x 6 C24 Brushed	Thermo-Alder 1 x 4 STS4	Thermo-Alder 5/4x4 SHP	Thermo-Spruce 1 x 4 STS4 Brushed Black	- Thermo-Pine - Black Hardware - Clear Glass
			MODERN - ATHLETIC	6-8	Side Windows	8.25'		6.25'	8.04'	Ignite Spruce 1 x 6 C24 Brushed	Thermo-Alder 1 x 4 STS4	Thermo-Alder 5/4x4 SHP	Thermo-Spruce 1 x 4 STS4 Brushed Black	- Thermo-Pine - Black Hardware - Clear Glass
			TRADITIONAL - SOCIAL	6-8	Corner Windows	8.25'		6.25'	8.04'	Kodiak Spruce 1 x 8 C15	Thermo-Spruce 1 x 4 STS4	Thermo-Spruce 5/4x4 SHP	Thermo-Spruce 1 x 4 STS4 Brushed Black	- Thermo-Pine - Black Hardware - Clear Glass
			TRADITIONAL - ATHLETIC	6-8	Side Windows	8.25'		6.25'	8.04'	Kodiak Spruce 1 x 8 C15	Thermo-Spruce 1 x 4 STS4	Thermo-Spruce 5/4x4 SHP	Thermo-Spruce 1 x 4 STS4 Brushed Black	- Thermo-Pine - Black Hardware - Clear Glass



Ignite Barrel Sauna No62
Photo: Idyll Reserve
Hocking Hills, Ohio



Ignite Barrel Sauna No62
Photo: Idyll Reserve
Hocking Hills, Ohio



Natural Barrel Sauna No60
Photo: ThisxLife, Bela Fishbeyn
Fairview, North Carolina



Sauna Square No40

SAUNA MATERIALS

SPECIES: USE:

- Natural Alder
- Natural Aspen
- Medium Alder
- Medium Aspen
- Medium Magnolia
- Intense Alder
- Intense Spruce
- Interior

Walls & Benches, Medium Aspen
Photo: Elvo Jakobson
Private Home, Estonia

SAUNA[®]
MATERIALS by THERMORY[®]

Wall Paneling

PRODUCT		SPECIES	DIMENSIONS	COVERAGE	LENGTHS	MODIFICATION STRENGTH	TEXTURE	INSTALLATION
	5/4 X 3 NATURAL ALDER STEP	Alder	1.06" x 2.5"	2.2"	6' – 10'	None	Smooth	Staple
	1 X 5 NATURAL ALDER STS4	Alder	.59" x 4.7"	4.4"	6' – 10'	None	Smooth	Staple
	1 X 5 NATURAL ALDER STS4 BRUSHED	Alder	.59" x 4.7"	4.4"	6' – 10'	None	Brushed	Staple
	1 X 4 NATURAL ALDER STS4	Alder	.59" x 3.5"	3.2"	6' – 10'	None	Brushed	Staple
	1 X 5 NATURAL ASPEN STS4	Aspen	.59" x 4.7"	4.4"	6' – 10'	None	Smooth	Staple
	1 X 4 ALDER STS4 (JEM)	Alder	.59" x 3.5"	3.2"	6' – 10'	Medium	Smooth	Staple

 
PRODUCT		SPECIES	DIMENSIONS	COVERAGE	LENGTHS	MODIFICATION STRENGTH	TEXTURE	INSTALLATION
	1 X 5 ALDER STS4	Alder	.59" x 4.7"	4.4"	6' – 10'	Medium	Smooth	Staple
	5/4 X 3 ASPEN STEP	Aspen	1.06" x 2.5"	2.2"	6' – 10'	Medium	Smooth	Staple
	1 X 4 ASPEN STS4	Aspen	.59" x 3.5"	3.2"	6' – 10'	Medium	Smooth	Staple
	1 X 5 ASPEN STS4	Aspen	.59" x 4.7"	4.4"	6' – 10'	Medium	Smooth	Staple
	1 X 4 ASPEN KYTE	Aspen	.59" x 3.4"	3.1"	6' – 10'	Medium	Smooth	Staple
	1 X 4 ASPEN VIRE	Aspen	.59" x 3.5"	3.1"	6' – 10'	Medium	Smooth	Staple
	5/4 X 3 ASPEN WAVE	Aspen	1.1" x 2.6"	2.2"	6' – 10'	Medium	Smooth	Staple
	*SPECIAL ORDER* 1 X 4 ASPEN STF TILES	Aspen	.59" x 3.2"	3.0"	11.50" or 22.75"	Medium	Smooth	Staple
	*SPECIAL ORDER* 1 X 4 ASPEN SRP	Aspen	.59" x 3.1"	2.8"	6' – 10'	Medium	Smooth	Staple
	1 X 6 MAGNOLIA STS10	Magnolia	.56" x 5.7"	5.4"	6' – 10'	Medium	Smooth	Staple
	1 X 7 MAGNOLIA STS10	Magnolia	.56" x 6.7"	6.4"	6' – 10'	Medium	Smooth	Staple

PRODUCT		SPECIES	DIMENSIONS	COVERAGE	LENGTHS	MODIFICATION STRENGTH	TEXTURE	INSTALLATION
	1 X 5 ALDER STS4	Alder	.59" x 4.7"	4.4"	6' – 10'	Intense	Smooth	Staple
	1 X 4 SPRUCE STS4	Spruce	.59" x 3.5"	3.2"	6' – 10'	Intense	Smooth	Staple
	1 X 4 SPRUCE STS4	Spruce	.59" x 3.5"	3.2"	6' – 10'	Intense	Smooth	Staple

SAUNA

MATERIALS by THERMORY®

Bench Boards

PRODUCT		SPECIES	DIMENSIONS	COVERAGE	LENGTHS	MODIFICATION STRENGTH	TEXTURE	INSTALLATION
	1 X 4 NATURAL ALDER SHP	Alder	.83" x 3.5"	3.5"	6' – 10'	None	Smooth	40mm FG Screws
	5/4 X 4 NATURAL ALDER SHP	Alder	1.1" x 3.5"	3.5"	6' – 10'	None	Smooth	40mm FG Screws
	5/4 X 4 NATURAL ASPEN SHP	Aspen	1.1" x 3.5"	3.5"	6' – 10'	None	Smooth	40mm FG Screws
	5/4 X 4 ALDER SHP	Alder	1.1" x 3.5"	3.5"	6' – 10'	Medium	Smooth	40mm FG Screws
	1 X 4 ASPEN SHP	Aspen	.83" x 3.5"	3.5"	6' – 10'	Medium	Smooth	40mm FG Screws
	5/4 X 4 ASPEN SHP	Aspen	1.1" x 3.5"	3.5"	6' – 10'	Medium	Smooth	40mm FG Screws
	5/4 X 8 MAGNOLIA SHP	Magnolia	1.1" x 7.3"	7.3"	6' – 10'	Medium	Smooth	40mm FG Screws
	5/4 X 4 ALDER SHP	Alder	1.1" x 3.5"	3.5"	6' – 10'	Intense	Smooth	40mm FG Screws
	5/4 X 4 SPRUCE SHP	Spruce	1.01" x 3.5"	3.5"	6' – 10'	Intense	Smooth	40mm FG Screws



Walls, Bench, Ceiling: Intense Alder
Photo: Elvo Jakobson
Private Home, Estonia

READY-MADE ELEMENTS

SPECIES: USE:

Natural Alder Interior
Medium Aspen

Bench & Backrest: Alder
Photo: Allan Lepikson
Private Home, Estonia.

SAUNA^o
MATERIALS by THERMORY®

Sauna Elements

PRODUCT		SPECIES	THICKNESS / HEIGHT	WIDTH	LENGTH	MODIFICATION STRENGTH	TEXTURE	INSTALLATION
	ALDER BENCH MODULE	Alder	Height - 5.5	19.7” - 23.6”	63” - 94.5”	None	Smooth	Screw
	ASPEN BENCH MODULE	Aspen	Height - 5.5	19.7” - 23.6”	63” - 94.5”	Medium	Smooth	Screw
	ALDER CORNER BENCH MODULE	Alder	Height - 5.5	19.7” - 23.6”	19.7” - 23.6”	None	Smooth	Screw
	ASPEN CORNER BENCH MODULE	Aspen	Height - 5.5	19.7” - 23.6”	19.7” - 23.6”	Medium	Smooth	Screw
	ALDER BACKREST	Alder	Thickness - 1.1	11.8”	80.7”	None	Smooth	Screw
	ASPEN BACKREST	Aspen	Thickness - 1.1	11.8”	80.7”	Medium	Smooth	Screw

PRODUCT		SPECIES	THICKNESS / HEIGHT	WIDTH	LENGTH	MODIFICATION STRENGTH	TEXTURE	INSTALLATION
	ALDER BENCH SKIRT	Alder	Thickness - 0.55	11.8”	94.5”	None	Smooth	Screw
	ASPEN BENCH SKIRT	Alder	Thickness - 0.55	11.8”	94.5”	Medium	Smooth	Screw
	ASPEN FLOORGRID	Aspen	Thickness - 0.55	31.5”	35.4”	Medium	Smooth	Screw
	ASPEN ADJUSTABLE VENTILATION GRILLE	Aspen	-	5.2”	11.1”	Medium	Smooth	Screw
	ASPEN VENTILATION FIXED GRILLE	Aspen	-	5.9”	7.5”	Medium	Smooth	Screw
	ASPEN MOVEABLE BENCH	Aspen	Thickness - 0.55	15.7”	27.6”	Medium	Smooth	-
	ASPEN HEADREST	Aspen	Thickness - 3.8”	11”	13.2”	Medium	Smooth	-



Walls & Benches: Medium Magnolia
Teras Beach, Tallinn, Estonia

Mouldings

PRODUCT		SPECIES	DIMENSIONS	COVERAGE	LENGTHS	MODIFICATION STRENGTH	TEXTURE	INSTALLATION
	1 X 1.5 ALDER T	Alder	.67" x 1.26"	-	6' – 10'	None	Smooth	Nail
	1 X 1 ALDER SI	Alder	.59" x .71"	-	6' – 10'	None	Smooth	Nail
	1 X 1 ALDER SHP	Alder	.83" x .83"	-	6' – 10'	None	Smooth	Nail
	1 X 1.5 ASPEN T	Aspen	.67" x 1.26"	-	6' – 10'	Medium	Smooth	Nail
	1 X 1 ASPEN SI	Aspen	.59" x .71"	-	6' – 10'	Medium	Smooth	Nail
	1 X 1 ASPEN SHP	Aspen	.83" x .83"	-	6' – 10'	Medium	Smooth	Nail

SAUNA DOORS & WINDOWS

SPECIES:

Medium Aspen

USE:

Interior

Walls: Medium Aspen, Kytë
Benches: Medium Aspen

Sauna Doors & Windows

PRODUCT		SPECIES	USE	THICKNESS X WIDTH	HEIGHT	MODIFICATION STRENGTH	GLASS COLOR	HARDWARE
	ASPEN PREMIUM DOOR	Aspen	Interior Sauna	3.6" x 27.2"	74.4" - 78.3"	Medium	Clear	Silver
	ASPEN BLACK PREMIUM DOOR	Aspen	Interior Sauna	3.6" x 27.2"	74.4" - 78.3"	Medium	Gray	Black
	PINE PREMIUM DOOR	Pine	Exterior Interior Sauna	3.6" x 27.2"	74.4" - 78.3"	Intense	Gray	Black
	2 X 6 ASPEN BLACK WINDOW	Aspen	Interior Sauna	3.6" x 19.3"	74.4"	Medium	Gray	Screw
	2 X 3 ASPEN BLACK WINDOW	Aspen	Interior Sauna	3.6" x 19.3"	35.0"	Medium	Gray	Screw



Walls: STS4. Benches: Benchmark Ash
Design: Anne Määrmann. Photo: Karl Kasepöld



ACCESSORIES & CARE PRODUCTS



Natural Barrel Sauna No62
Photo: Molly Milroy
Ashville, North Carolina

PRODUCT	NAME	TYPE	USE
	HALU B.V. HEADREST	Natural Aspen	Sauna Headrest
	HALU B.V. BACKREST	Natural Aspen	Sauna Backrest
	HUUM SAUNA STONES	Olivine Diabase Rocks	HUUM Drop & Hive Mini Heaters
	ACCESORIES PACK	Bucket, Ladle, Sand Timer, Temperature Gauge	Adding Water, Temperature, Timing
	SUPI SAUNAVAHA SAUNA WAX	Clear Wax	Sauna Benches, Paneled Walls And Ceilings, Doors & Window Frames.
	SUPI SAUNAVAHA SAUNA WAX	Black Wax	Sauna Benches, Paneled Walls And Ceilings, Doors & Window Frames.
	SUPI SAUNAVAHA SAUNA CLEANER	Sauna Cleaning Detergent	For Saunas & Other Wet Rooms

Heat. Steam. Cool. Done.

Thermal modification is a chemical-free process that gives you the beauty of real wood, naturally enhanced with only heat and steam for unequaled strength and stability—even in changing weather conditions. And, with greater insulating properties compared to unmodified wood, our wood is never too hot on your feet.

The right wood. The right way.

We source all our wood using responsible forestry practices, never laying a finger on our tropical woodlands and rainforests. And wood is the only naturally renewable building material that doesn't generate hazardous waste. So, when you choose Thermory, you're not just investing in quality, but in the health of our planet too.



The mark of
responsible forestry



Thermory USA - Buffalo

56 Harvester Ave. Ste. 1-201
Batavia, NY 14020
585-591-6590

Support@ThermoryUSA.com
SaunaHelp@ThermoryUSA.com

Last updated: April 2025
All previous versions are null and void.

→ Sauna.ThermoryUSA.com



THERMORY®
LEAVE A LASTING IMPACT