

# Ubik

Shining Outside  
the Box




LUMENWERX




- Up to 1600 lm/ft
- Low glare with a UGR of 6\*
- 145 lm/W (HLO)
- Optical flexibility with parabolic louvers, HLO, wall wash or blanks

Ubik's eye-catching, raised-border end cap adds an elegant finishing touch.

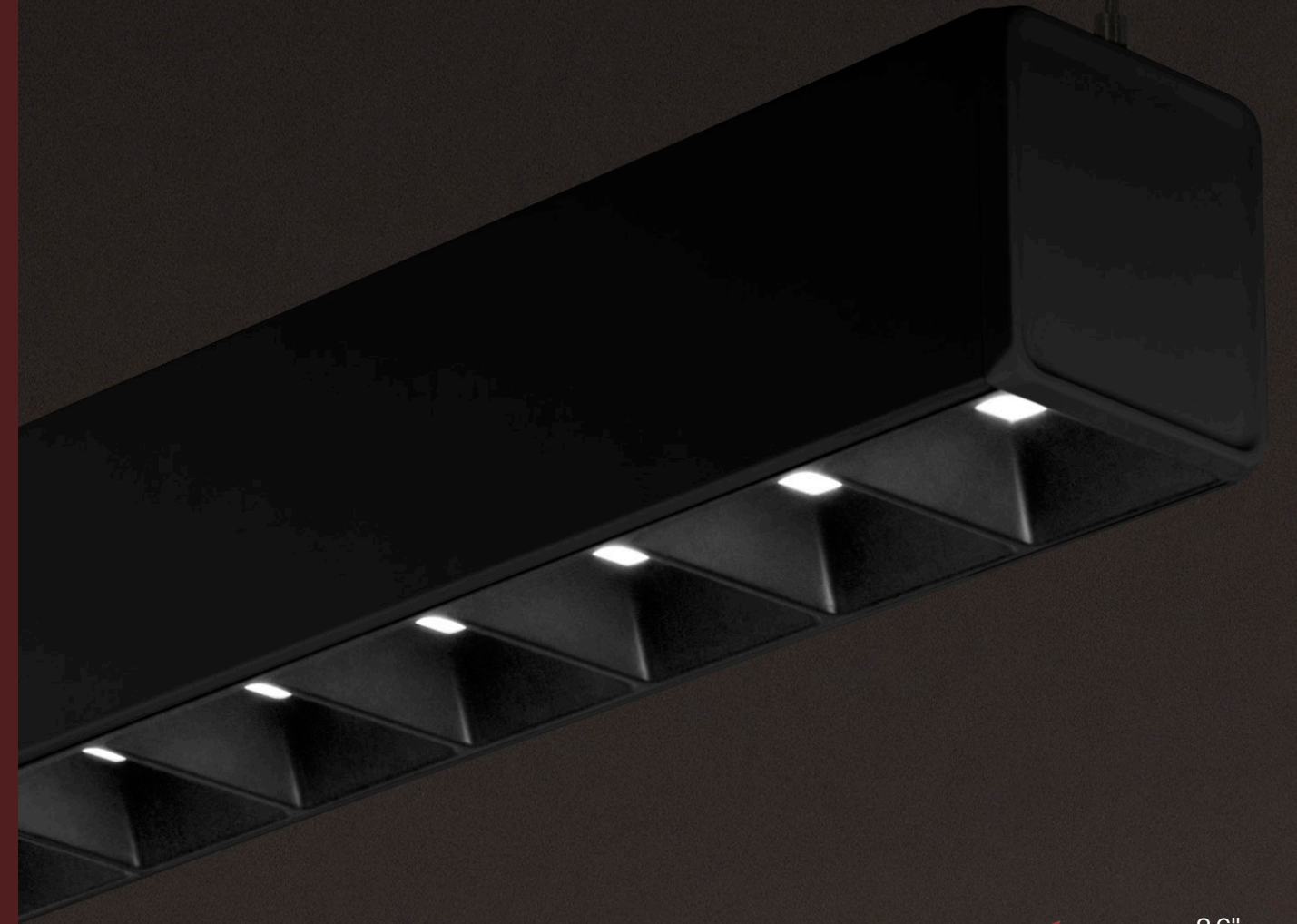

Flat end cap option

\*3500K, 500lm, black louvers

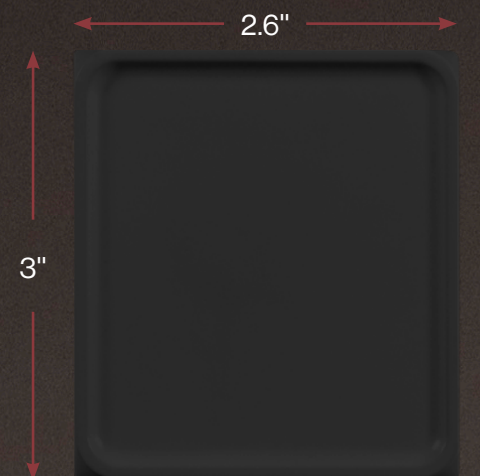

Contour end cap option



# Geometric harmony in a **Square**



**Ubik cube (linear downlight)**  
6-cell parabolic louver  
9-cell wall wash

**Ubik pendant**  
Single unit, parabolic louver



# Meet the family

## Linear

### Play with lines, patterns, and corners.

Define, punctuate, enrich your spaces with Ubik. Install pendant and wall fixtures as individual luminaires or in continuous runs and patterns. Balance lit and unlit areas to create contrast and drama with a chiaroscuro effect. Enabled by our High-Efficiency Lambertian Optic (HLO), Ubik can transform dim corners into bright design features.



Parabolic louvers



HLO

 


Wall wash

## Combination

### Variety is the spice of light.

Mix and match optics to add interest and functional diversity to spaces. Parabolic louvers are available in three matte colors—black, silver, and white—HLO, and blanks. Create patterns or combinations, the possibilities are unlimited with Ubik.



Parabolic louvers - HLO - Wall wash - Blanks

## Cube

(linear downlight and pendant)

### Compact, flexible, and powerful.

Cubes acts as linear downlights or pendant option offered with three, six, and nine cells. They are available with parabolic louvers, HLO, and wall wash optics. Performance ranges up to 2400 lumens delivered.



3 cells



6 cells



9 cells

Parabolic louvers - HLO - Wall wash

## Perimeter

### Where wall and ceiling meet...

Enjoy perimeter lighting that gently washes down your wall from the edge of the ceiling. Available in leveled, shallow, and deep recessed, Ubik Perimeter can enhance any space with a soft, low-glare ambiance.



Parabolic louvers - HLO



# Meet the family


(continued)

## Architectural Troffer

### Sophistication in a square

Add visual comfort and reduce glare with Ubik Troffer, offered with centered parabolic louvers and side lenses that provide indirect, reflected, soft diffused distribution using Tri-flect technology.

2x2

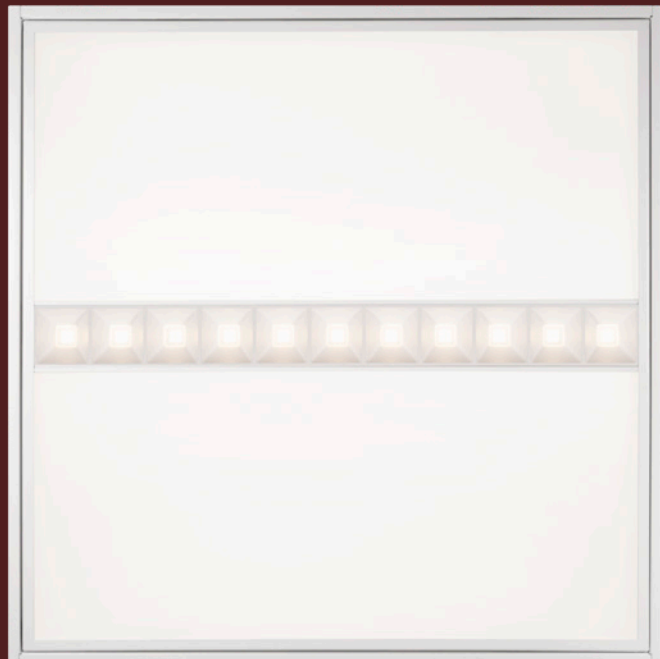



# Ubik linear

## Performance

Ubik is one of the most commanding 2" aperture luminaires on the market, packing a powerful punch of up to 1600 lumens per foot. With five standard lumen packages, Ubik also has the flexibility to illuminate many types of spaces. And if that weren't enough, optics are interchangeable within the same linear run, allowing for even more creative options.

## UGR 6

Black parabolic louvers offer an industry best range of 6-8 UGR.

## 137 lm/W

Ubik is an industry standout with 137 lm/watt delivered with parabolic louvers.

## L90

## < 150 000 hrs

Offering excellent lifetime at TM21 L90 >60 000 hrs and calculated at <150 000 hrs.



PoE and Bios technology available

## WELL

### WELL building

Ubik family meets the WELL building standard for UGR of <19 in all available lumen packages.

### Unity Pointed (UP) Technology

For our entire Ubik family, once you decide the output, each luminaire, regardless of shape and size, will emit identical luminous intensity values, precisely measurable down to the square inch with Unity Pointed (UP) technology.



Optic	Parabolic		
	Matte White	Matte Black	Matte Silver
Finish	Matte White	Matte Black	Matte Silver
Beam angle (FWHM)	91°	89°	86°
UGR*	12	6	8
Efficacy (lm/W)	137	109	125

\* Lumen package: 500 lm/ft



# Versatility

## Mounting options



Pendant



Wall



Recessed

## Color temperature



2700K



3000K



3500K



4000K

bios

Bios



SOLA



DUO

## Louver finish



Matte  
White



Matte  
Black



Matte  
Silver

## Color rendering option

80+

90+ (R9 > 50)

## Distribution



Direct



Direct/  
Indirect



Indirect

## Variations

Linear

Continuous runs

Patterns

Cubes (linear downlight)

Combinations

Perimeter

## Direct optics

Parabolic Louvers

High-Efficiency Lambertian Optic

Wall Wash

## Indirect optics

Wide Indirect Optic

Translucent Indirect Optic

Ubik has so many options to create fascinating spaces from wall mount to cube to recessed fixtures.






# Optical Flexibility


## Direct options

## Indirect options

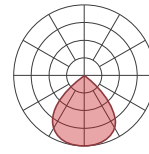



### Parabolic Louvers

All parabolic louvers emit soft brightness at the critical viewing angle delivering low-glare environments. They are the ideal solution for task lighting. Distribution can change slightly based on the color of the louvers. All feature a low-glare conical distribution, thereby limiting ceiling brightness.

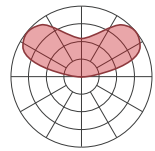


### Wide Indirect Optic

Ubik features the second generation of Wide Indirect Optic (WIO) offering impeccable indirect performance. With 8' spacing, the ideal to 2:1 ratio can be achieved with a 24" drop for best-in-class performance. Fixtures can be placed as close as 12" from the ceiling without creating undesirable hot spots.

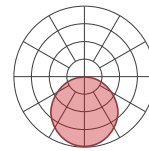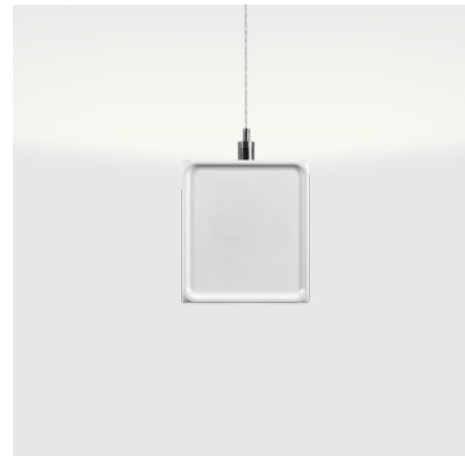



### High-Efficiency Lambertian Optic (HLO)

HLO is a clean smooth acrylic lens that creates melodic lines of light. Given that the lens is flush, as opposed to recessed, the distribution allows for high angles of light on the vertical surface. HLO is the perfect optic to create a bright, open space.

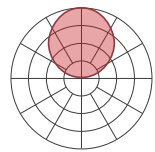

### Translucent Indirect Optic

Translucent Indirect Optic (TIO) is a simple optic that is ideal for mounting far from the ceiling. It also is very effective with Ubik wall mounted fixtures.

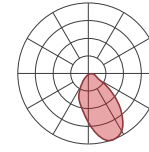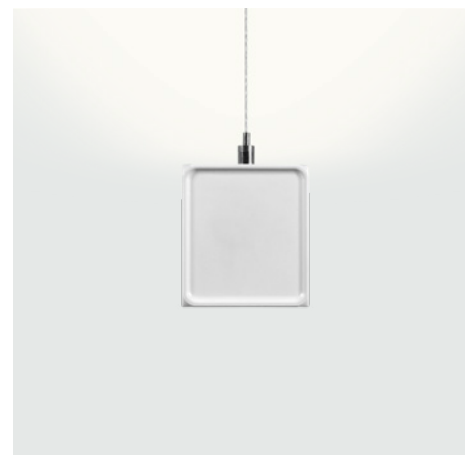

### Wall Wash

Wall wash is available in pendants, combinations, and cubes, and can achieve uniformity ratios of 3.5:1 on a 10' wall. Ubik wall wash offers a fully lit lens in a 2" square louver.





# Patterns, Corners and Combinations



With Ubik, designers can turn a single fixture into the focal point of a room or compose patterns within which optics can be combined to enrich visual interest even further.

## Lit corners

Light corners seamlessly using HLO, which can be combined with wall wash and parabolic louver optics, as well as blanks.



## Pendant


Ubik pendants can be used with a leveled corner arrangement.

## Recessed

Ubik recessed luminaires offer leveled, inner, and outer corner configuration options.

## Wall

Ubik wall fixtures can install with leveled inside corner and leveled outside corners.

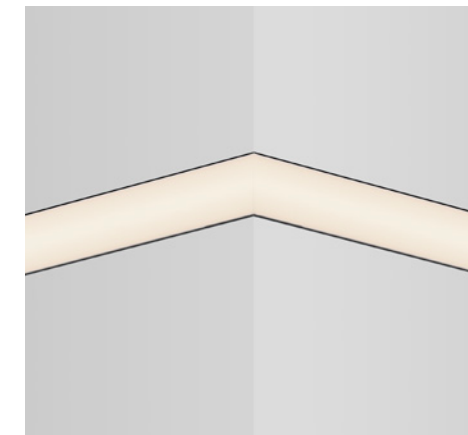

## Unlit corners

Corners can be unlit when you desire a smooth continuation of the lighting design. Unlit corners can match up to HLO, parabolic louvers, wall wash, or an additional blank unlit section.






# Ubik Cube

## Linear downlight or pendant

Ubik Cube delivers exceptional performance and versatility. Available in both linear downlight and pendant versions, the compact fixture is offered with HLO, parabolic louver, or wall wash optics. For the parabolic louvers, three matte (MPL) finishes are available in black, silver, and white. Similarly, our wall wash optics are available in black, silver, and white. For pendants, three standard housing colors are available (white, black and aluminium).

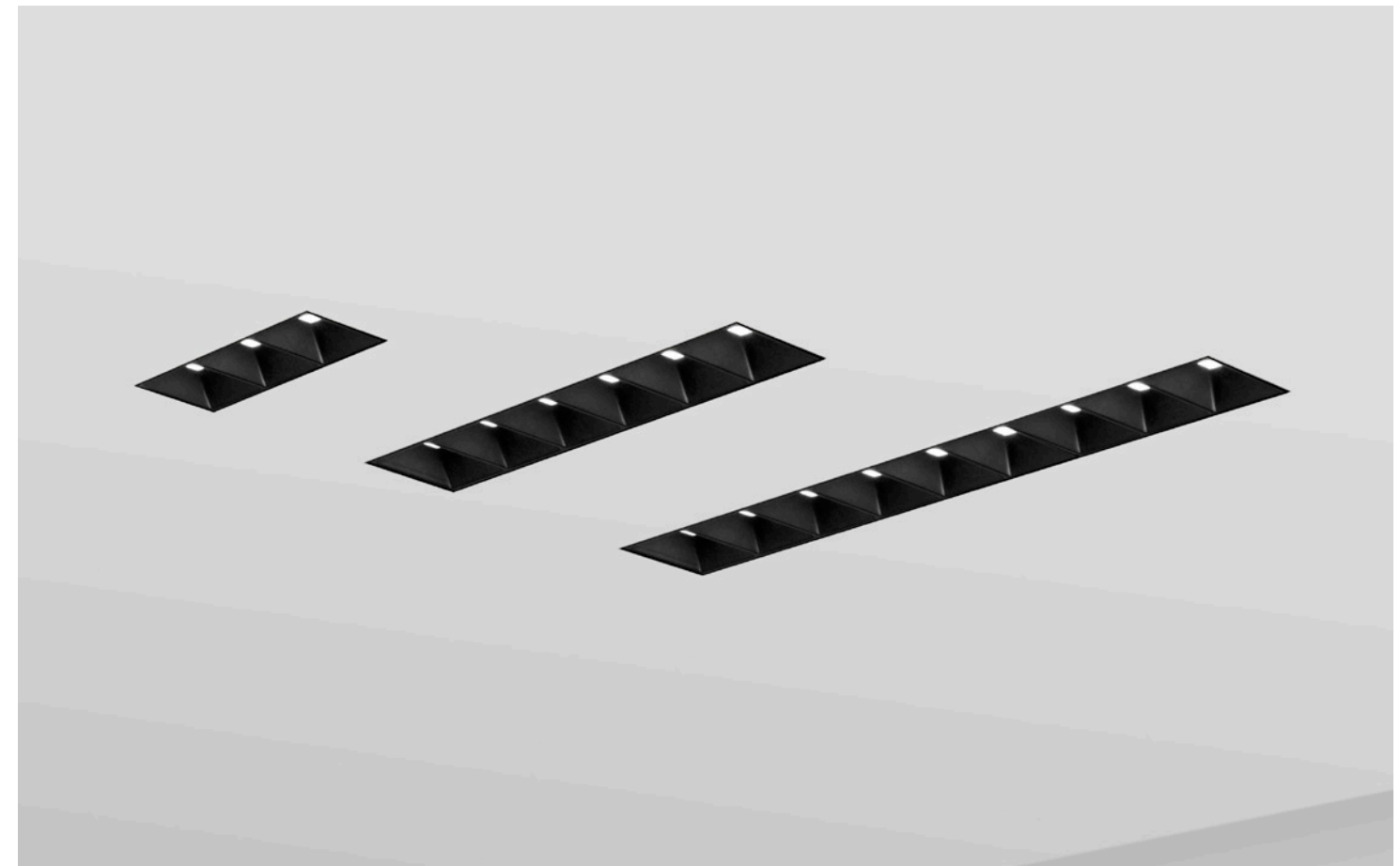

## Parabolic Louvers



Matte Black



Matte Silver



Matte White

## Wall Wash



Matte Black



Matte Silver



Matte White

## HLO





# Ubik Cube

## Performance

A cube of three cells can serve as the perfect accent, while a longer cube of nine cells can create a powerful general illumination or wall wash. Performance ranges up to 2400 lumens delivered.

### Performance

### Options

# of cells	Size	Output Integral	lm/W Louvers <sup>1</sup>	lm/W Wall wash <sup>1</sup>	lm/W HLO	Color Temp.	Optics	Mounting	Trim Options for Downlight
03 □□□	6 in	800 lm				2700K 3000K 3500K 4000K	HLO Parabolic Louvers Wall wash	Recessed Pendant	Trim Trimless Drywall mud flange
06 □□□□□□	12 in	1600 lm	137 lm/W	104 lm/W	145 lm/W	Bios Duo <sup>1</sup> Sola <sup>1</sup>			
09 □□□□□□□□	18 in	2400 lm							

Ubik, Recessed, 3500K, 80 CRI, white louvers finish





# Compact wall mount

Wall mounting Ubik offers low-glare subtle illumination, ideal for corridors, waiting rooms, stairwells, and more. You can choose direct or direct/indirect and select parabolic louvers or HLO for direct illumination, or WIO and TIO for indirect illumination. Ubik wall luminaires are sophisticated and easy on the eyes.

## Parabolic louvers



Matte White




Matte Black



Matte Silver

## HLO

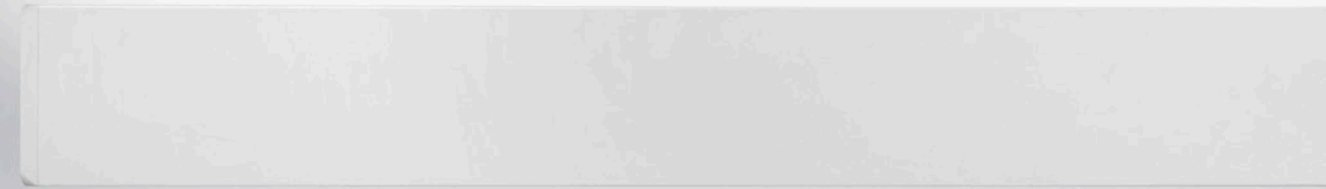

**Low-glare  
subtle  
illumination**

Ubik wall mount  
direct/indirect option



# Ubik Perimeter

Ubik Perimeter offers subtle, low-glare illumination in leveled, shallow, and deep recessed arrangements with parabolic louvers or HLO (High-Efficiency Lambertian Optic). Ubik Perimeter creates uniform illumination on walls, the effects of which can open up an entire space. Use it in offices, showrooms, corridors, hospitality locations, and more.

- 2.5” aperture opening
- Three mounting positions
- Low-glare perimeter solution
- Option of parabolic louvers or HLO



Ubik Perimeter White Parabolic Louvers

Brighten and broaden a space by illuminating perimeter walls.



# Ubik Perimeter

## Performance


Ubik Perimeter with its small aperture (2.5") can yield big and distinct results. Level, shallow, and deep-recessed housing options provide for dramatic, softer, or subtle looks respectively. Use parabolic louvers to add a subtle scalloping architectural effect emphasizing wall texture, or benefit from our HLO (High-Efficiency Lambertian Optic) and its smooth perimeter expression.

Up to


**1200 lm/ft**

Up to


**129 lm/W**

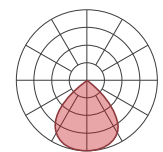

Parabolic Louver

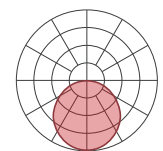

HLO

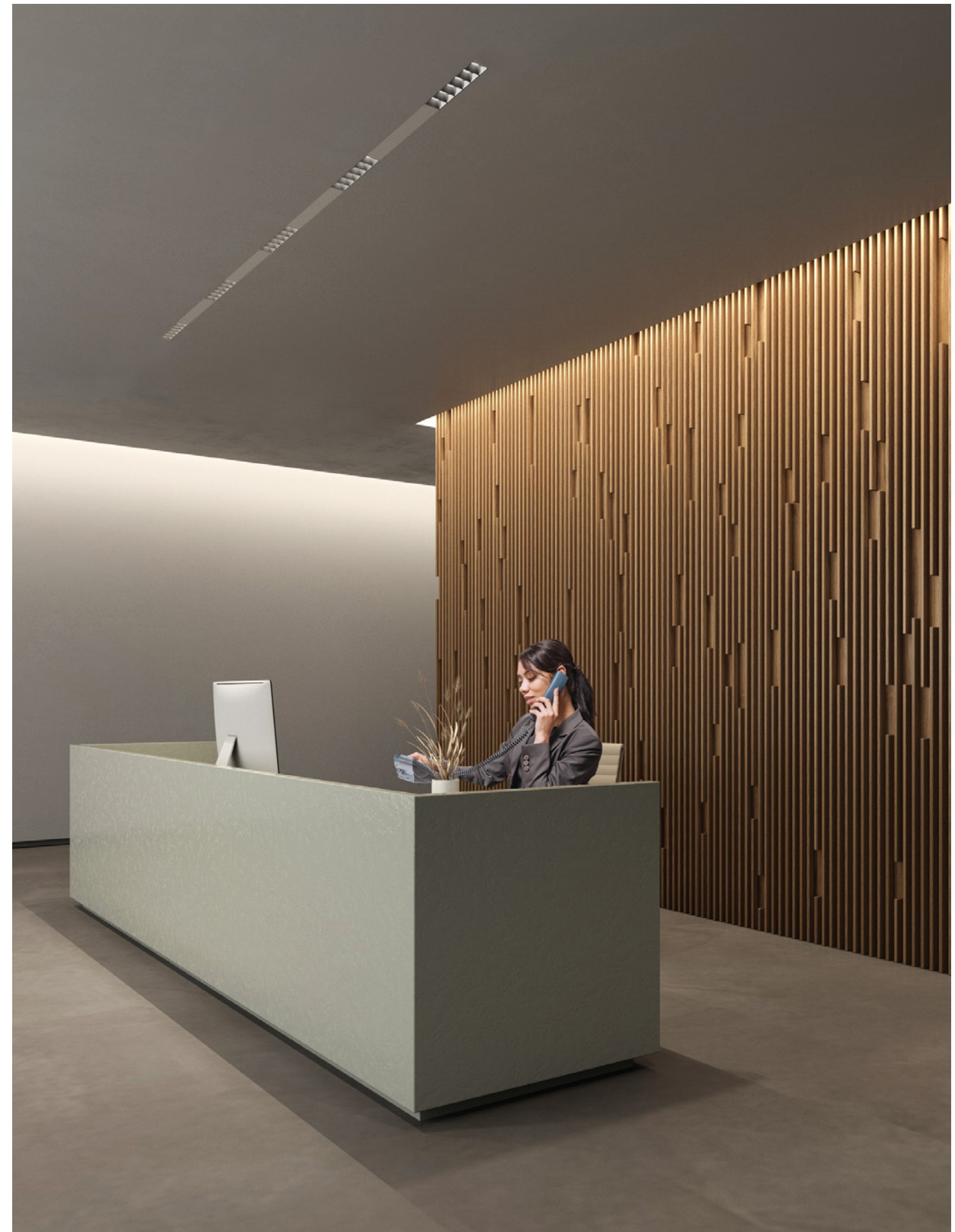




# Ubik Perimeter

## Construction


Ubik Perimeter is designed to offer lines of light that are seamless even at section transitions and corner junctions. The fixture can be mounted in a variety of ceiling systems (gypsum, t-bar, Armstrong TechZone, etc.), and for each option, the driver is positioned to be accessed from below the ceiling.

Ubik Perimeter HLO


## Mounting positions

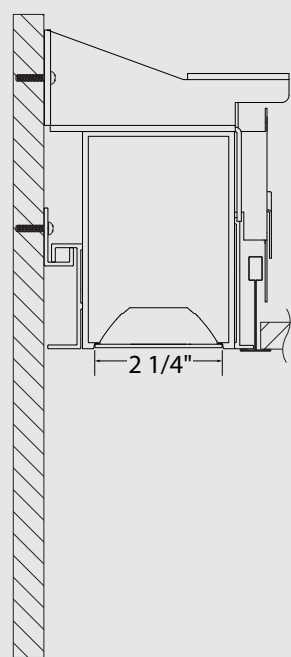

Ubik Perimeter Leveled

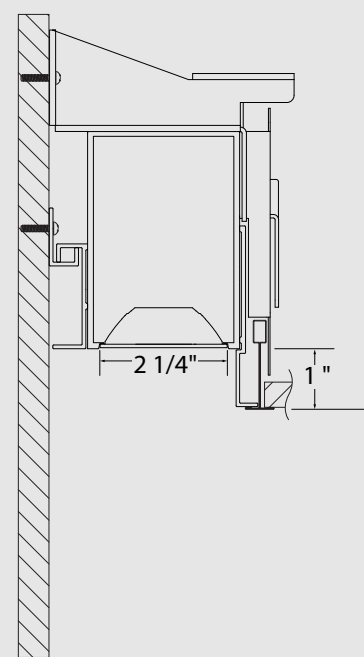

Ubik Perimeter Shallow

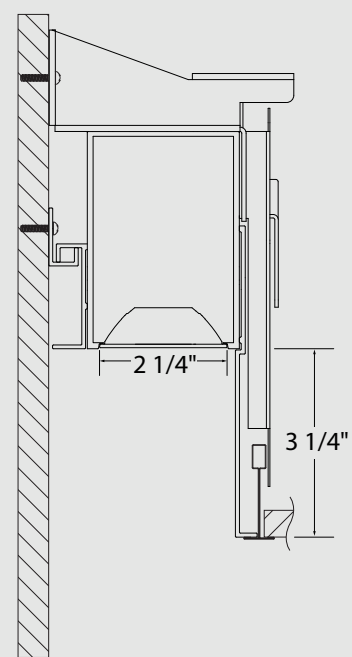

Ubik Perimeter Deep






# Ubik Troffer

Ubik's 2x2 Troffer bring style, sophistication, and a new dimension to the Ubik linear series, not to mention two color options for center channel louvers.

- Size: 2x2
- Low glare
- Two louver color options
- Easy maintenance from below the ceiling



Ubik Troffer 2x2

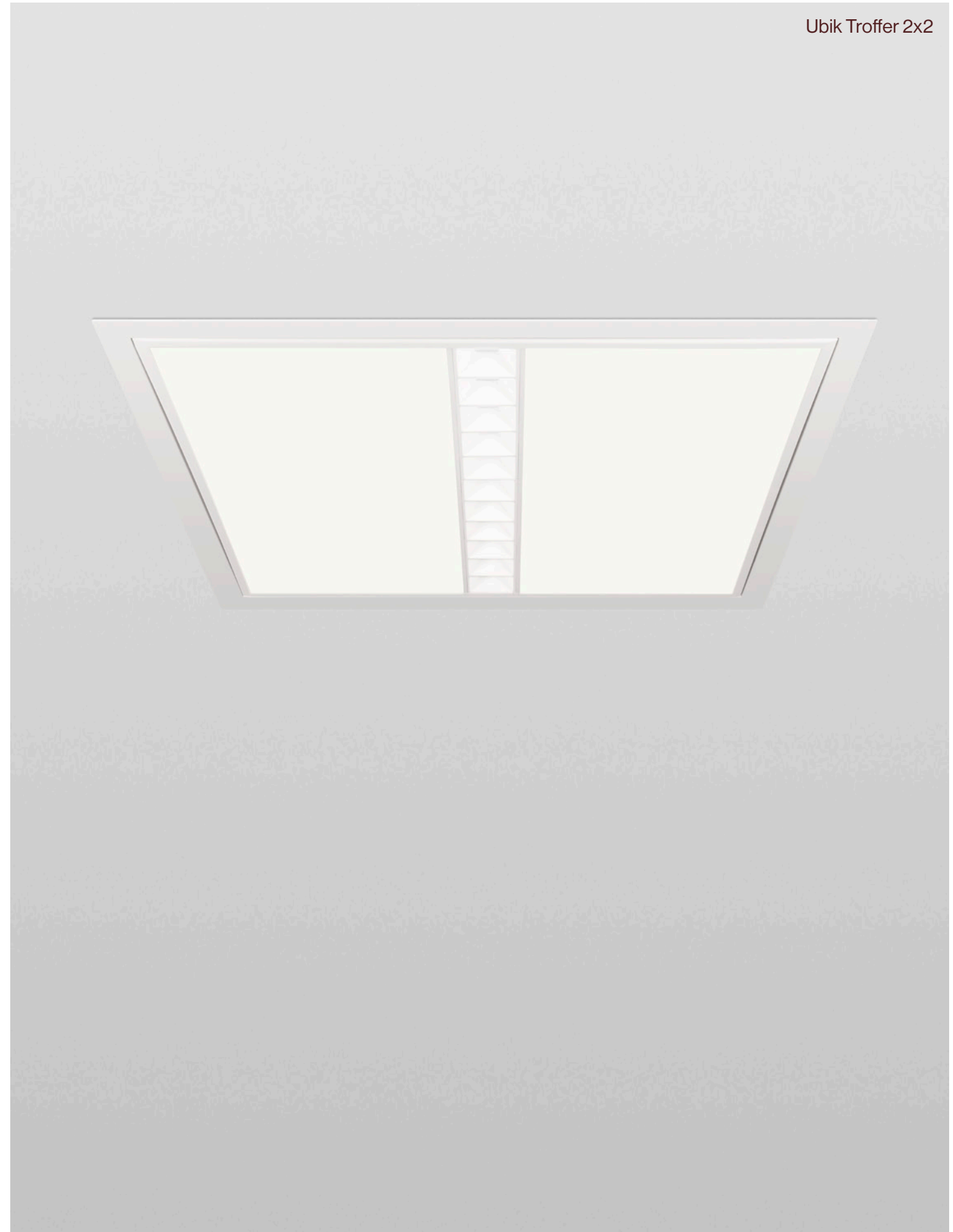



# Ubik Troffer

## Performance

Ubik Troffer creates visual comfort with its low-glare dual optical chamber performance. The center channel features the parabolic louvers that deliver a soft conical distribution. The side lenses provide indirect, reflected, soft diffused distribution using Tri-flect technology. The fixture offers 60/40 and 40/60 light distribution options and meets the WELL Building Standard™ guidelines for UGR values.

Up to


**4500 lm**

Up to


**117 lm/W**

Low glare

**UGR<19**

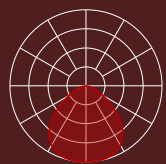

2x2, MPL & TFO, 60/40

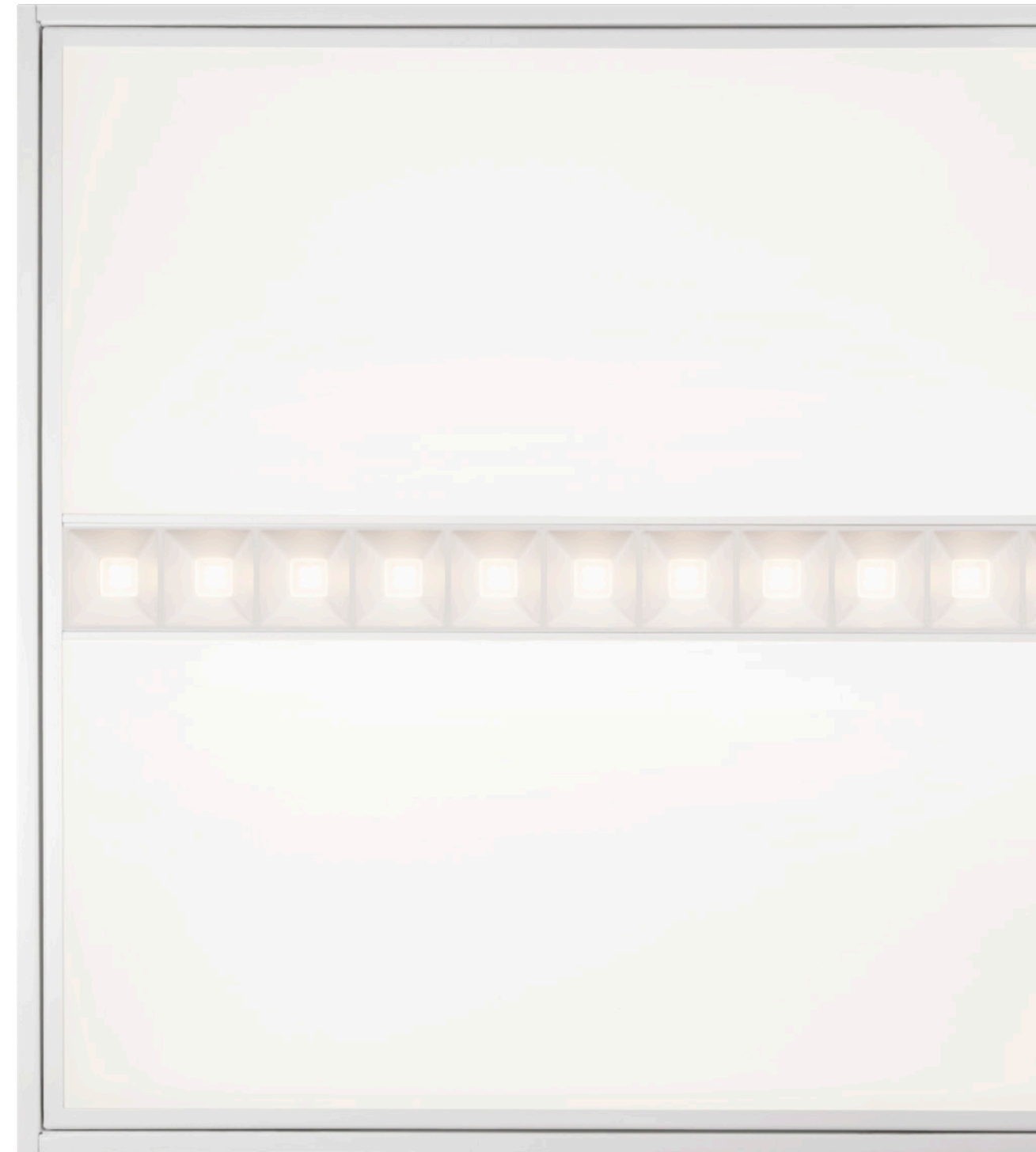

bios WELL™



# Ubik Troffer

Versatility

## Size

2x2

## Distribution options

60/40

40/60

## Color temperature



2700K



3000K



3500K



4000K

bios

Bios



SOLA



DUO

## Mounting options

T-Bar

Drywall

## Louver finish



Matte  
White





Matte  
Silver

## Color rendering option

80+

90+ (R9 > 50)

## Profile

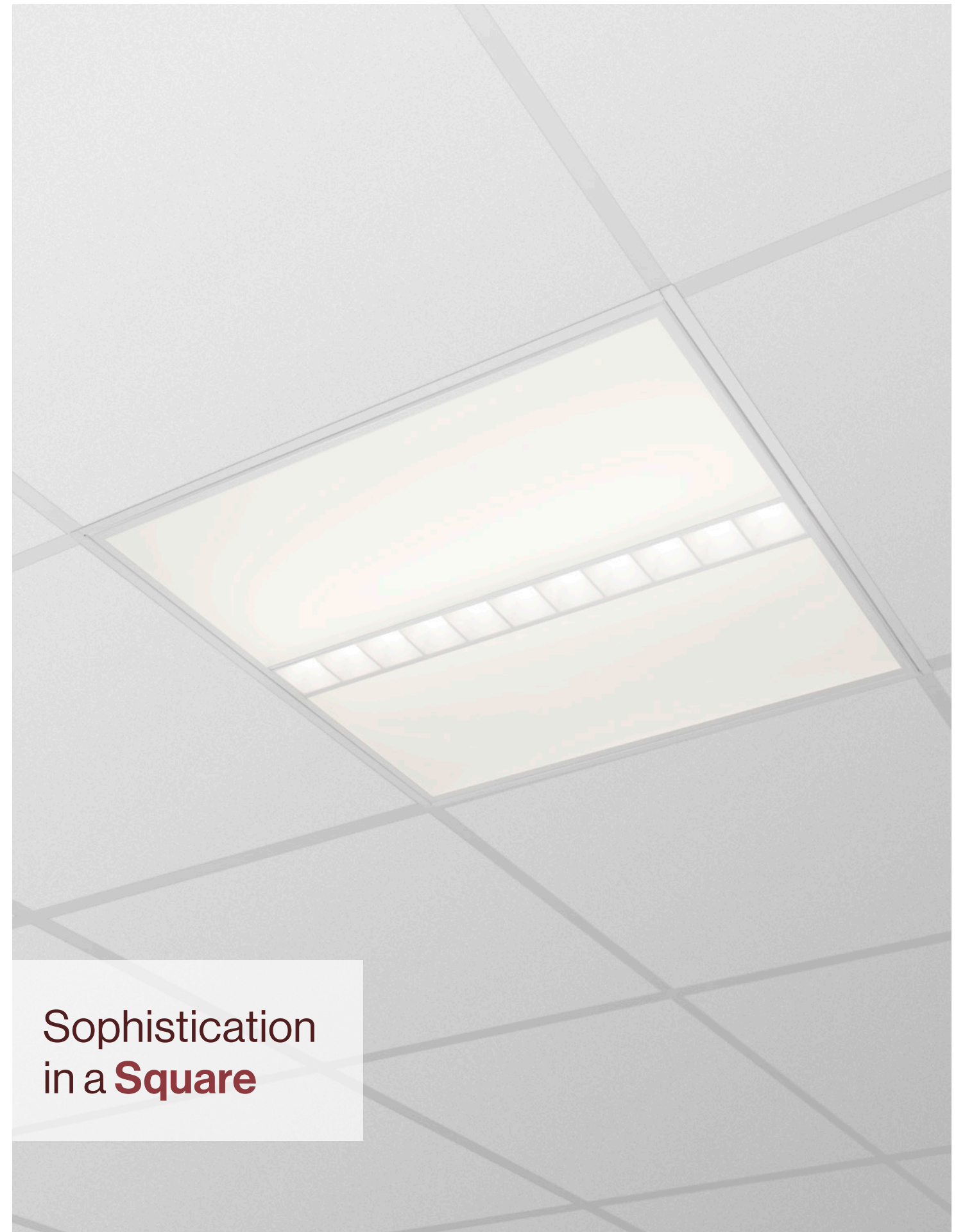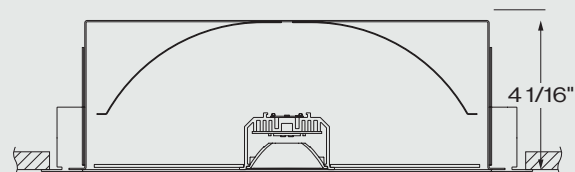

Sophistication  
in a **Square**



# Optimal visual comfort with Ubik Troffer



Ubik Troffer  
2x2, silver parabolic louvers





# Ubik linears application guide





# General lighting

## Unmatched Glare Control

UGR as low as 6 with black parabolic louvers

Ubik is offered in five standard lumen packages to allow for the best interior lighting environments to be created. Whether you choose direct or direct/indirect, Ubik is a comfortable luminaire. If you want ultra-low glare, Ubik black parabolic louvers offer an industry best UGR (between 6 and 8 depending on the output selected). If you want more vertical brightness, then HLO is the solution. You can mix and match in the same linear run with louvers and HLO and also use the Ubik cube downlight to set off the space.

- Up to 1600lm/ft
- Lit or unlit corners
- Linear Patterns and Combinations
- Ubik Cubes (linear downlights)





Amazing  
uniformity up to  
**3.5:1 max/min\***



\* Setback: 30", Spacing: 3', Wall height: 10'

# Wall Washing

 
A unique feature of the Ubik wall wash is that on higher walls of up to 20', the wall wash maintains excellent performance that surpasses that of leading competitors, which essentially stop performing beyond wall heights greater than 10'.

- Fully lit lens that matches the Ubik direct look
- Available in Ubik Linear, Cube, and Combination

Wall height	10 ft	15 ft	20 ft
Max/min	3.5:1	9.5:1	13.5:1

Ubik, 3500K, wall wash, set back: 30 inch, spacing : 3 ft

Recommended  
Set back:  
18"-30"



Uniformity: 3.5:1  
Set back: 30"  
Spacing : 3'  
Wall height: 10'





Ubik wall wash eclipses the competition on walls as high as **20 ft.**

Ubik: 3500K,  
Optic : wall wash  
Wall height: 20'

Set back: 30"  
Spacing : 3'  
Uniformity 13.5:1





# Wide Indirect Optic

This second generation of Wide Indirect Optic offers an impressive beam spread of 140 degrees, and is compatible for high-ceiling application with a far reach in all directions within the 140 degree range.

- Uniformity of 2:1
- Can be mounted 12 inches from the ceiling
- Far reaching indirect

<b>Spacing</b> (center to center)	8ft	10 ft	12 ft
<b>Max/min</b>	2:1	4:1	5:1

Ubik, 3500K, 18 ft, pendant, mounting height 24 in






# Lumenwerx solutions


Lumenwerx continues to expand, offering you more lighting solutions with the goal of bringing you the best luminaires in performance, technology, and style for your design needs.




Shell family

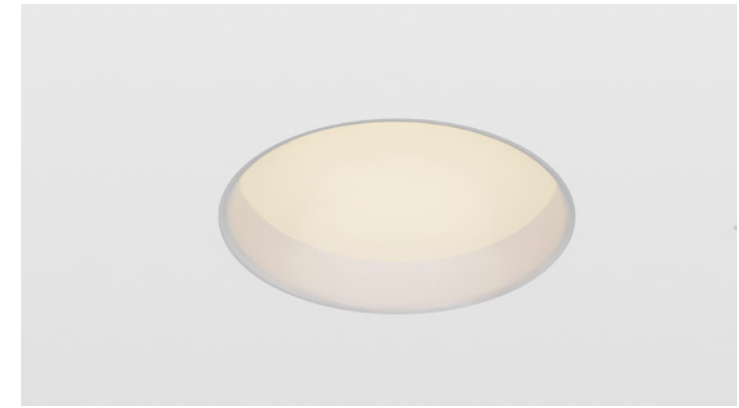

Pop family

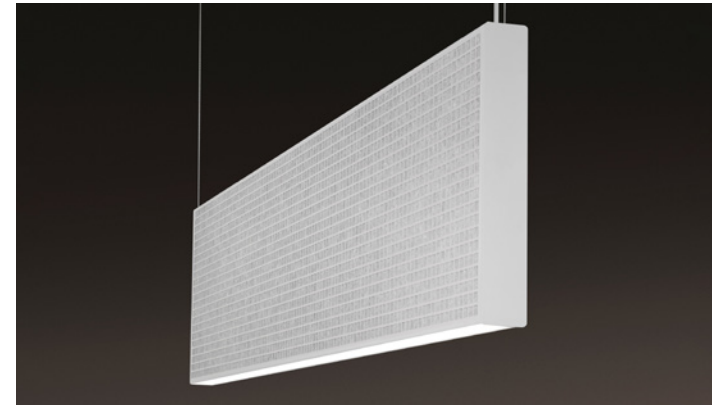

Audia

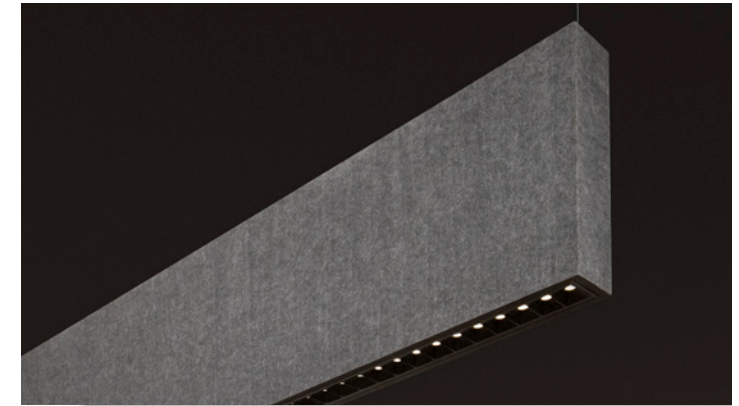


Acoustix Family (Squero acoustix)



Voilà downlights



Voilà Cylinders

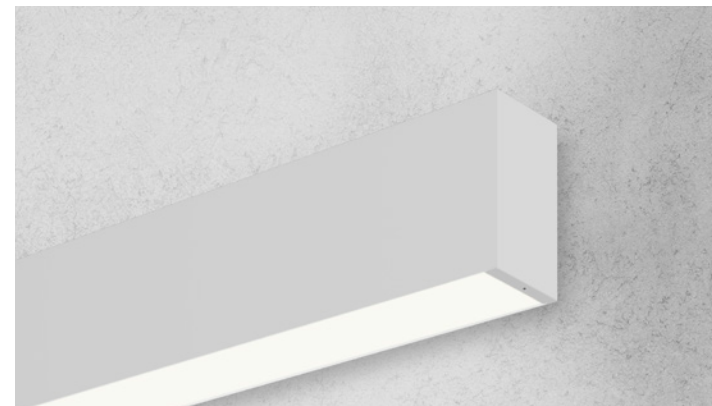

Via Seal family



Rim

Find more at  
[lumenwerx.com](http://lumenwerx.com)

# Ubik



**Lumenwerx**  
3737 boul. de la Côte-Vertu  
Saint-Laurent, QC  
H4R 2C9

**[lumenwerx.com](http://lumenwerx.com)**  
T.: 514.225.4304  
F.: 514.931.4862

**LUMENWERX**