



RT acoustic







BLOCK
 BEAT

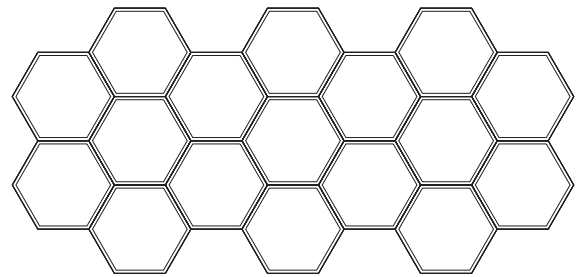

**BB01
COMB**

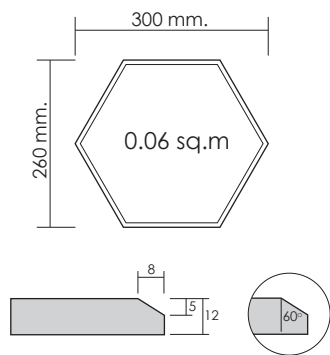

17 Panels / 1 sq.m*

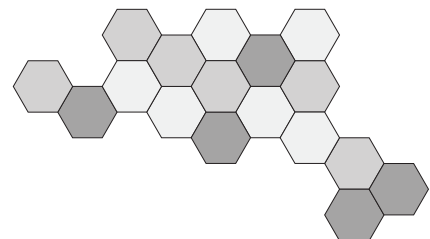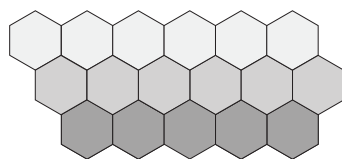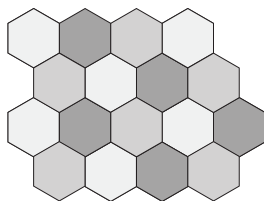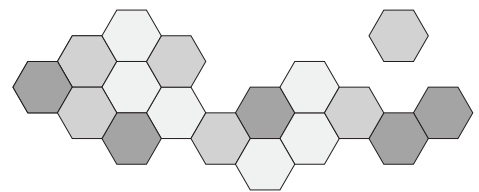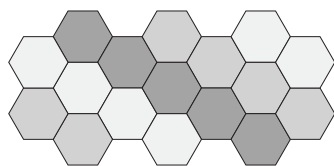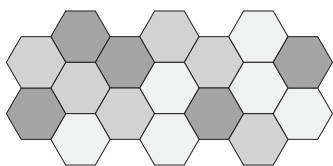

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010








Energetic vibe
A004 A012 A011



*2 sq.m. / Package



**BB02
MOSAIC**

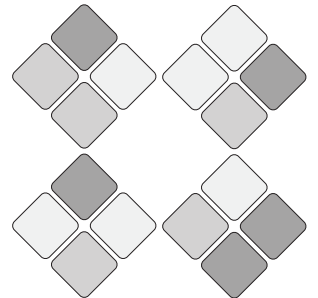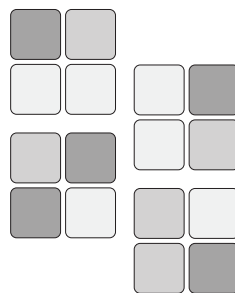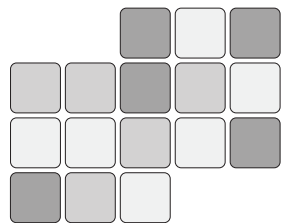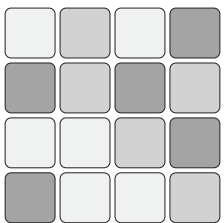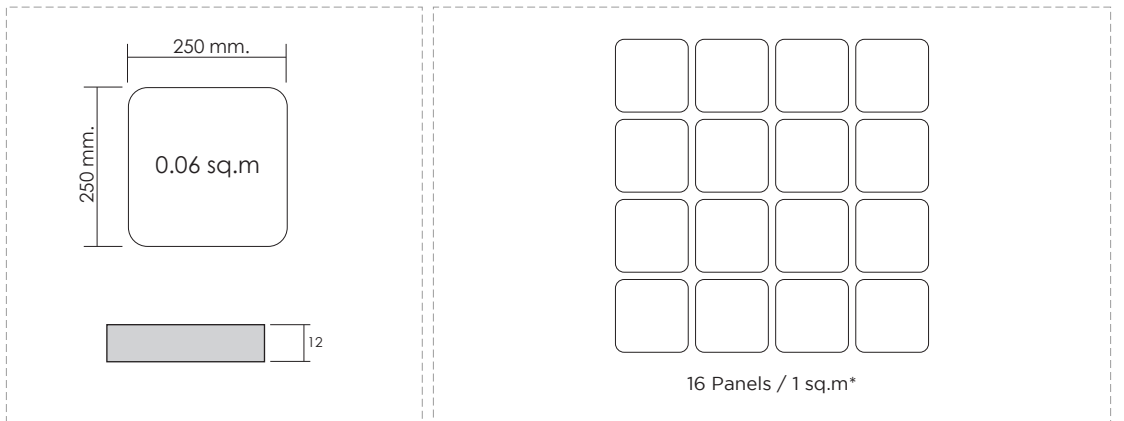

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010





Energetic vibe
A004 A012 A011






*2 sq.m. / Package



**BB03
BOXSTEP**

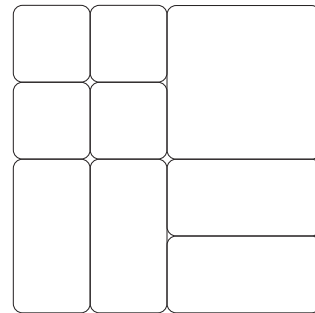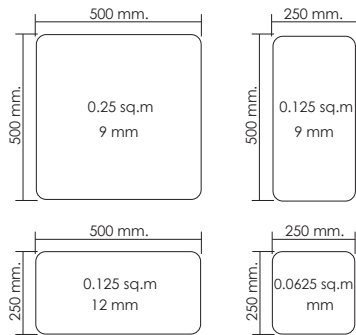

9 Panels / 1 sq.m*

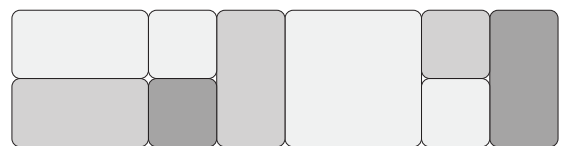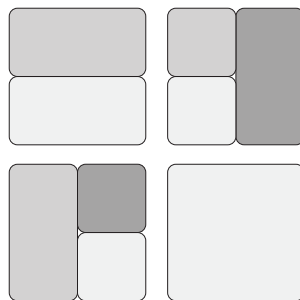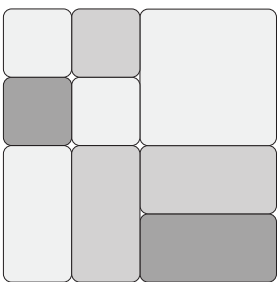

*2 sq.m. / Package

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010






Energetic vibe
A004 A012 A011








 **BB04
BRIX**

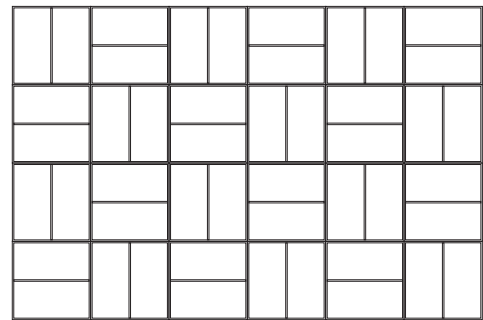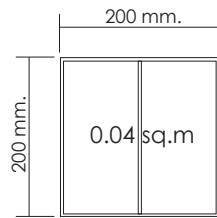

24 Panels / 1 sq.m*

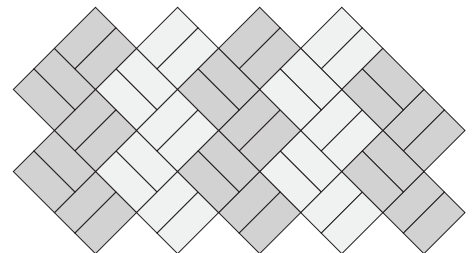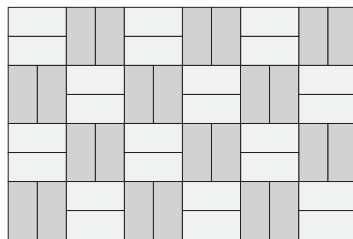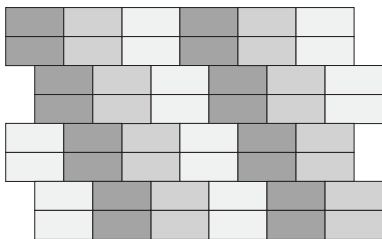

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010






Energetic vibe
A004 A012 A011






*2 sq.m. / Package



 **BB05
APEX**

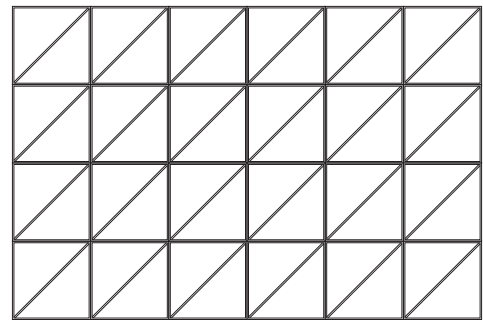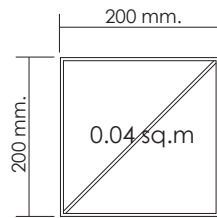

24 Panels / 1 sq.m*

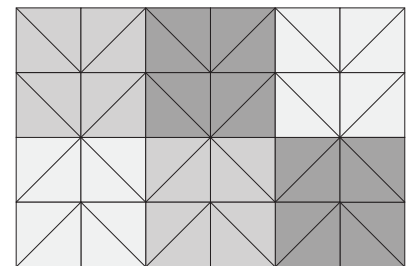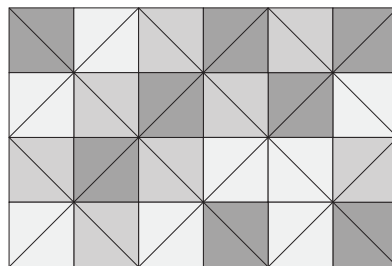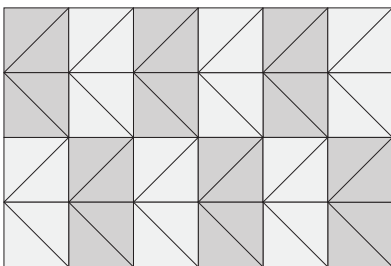

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010





Energetic vibe
A004 A012 A011







*2 sq.m. / Package



**BB06
VERTEX**

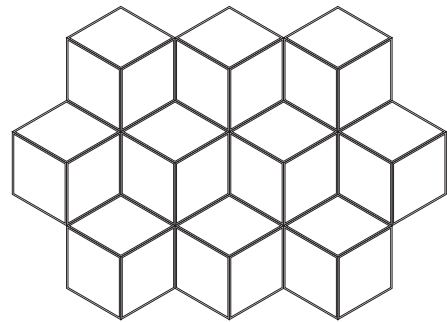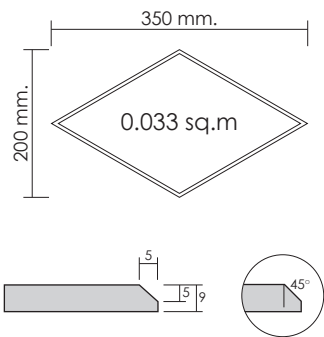

30 Panels / 1 sq.m*

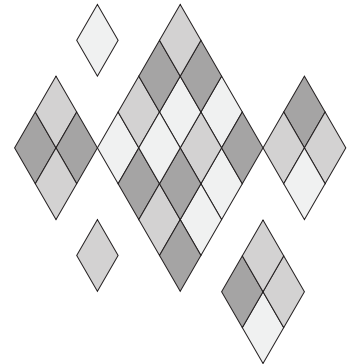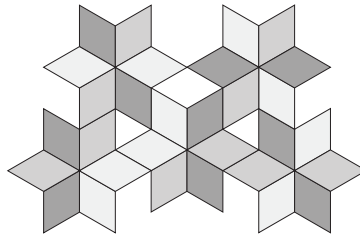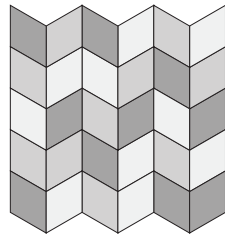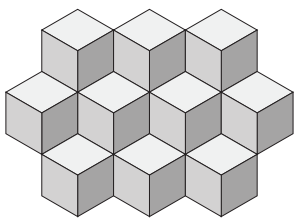

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010





Energetic vibe
A004 A012 A011






*2 sq.m. / Package



**BB07
MESH**

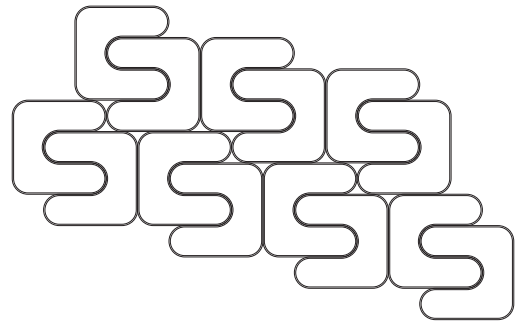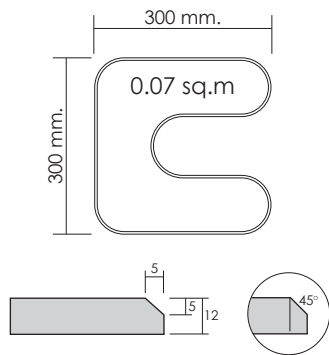

14 Panels / 1 sq.m*

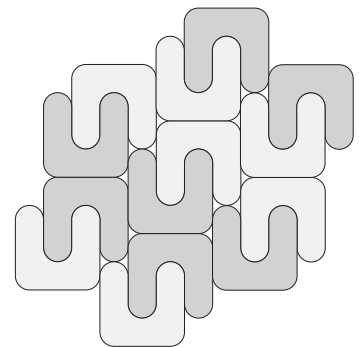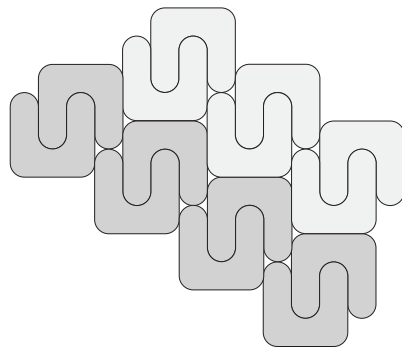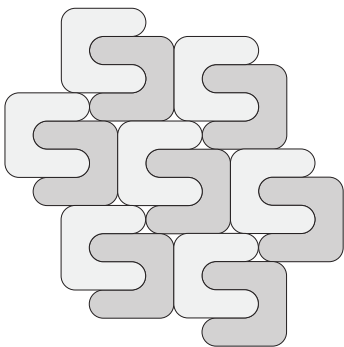

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010



Energetic vibe
A004 A012 A011






*2 sq.m. / Package



**BB08
FLOW**

12 Panels / 1 sq.m*

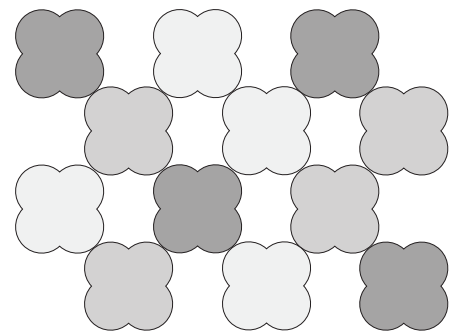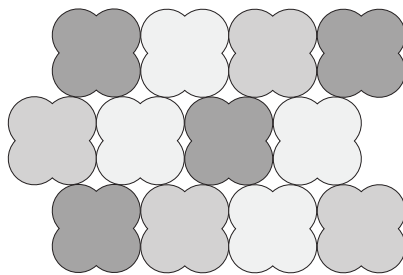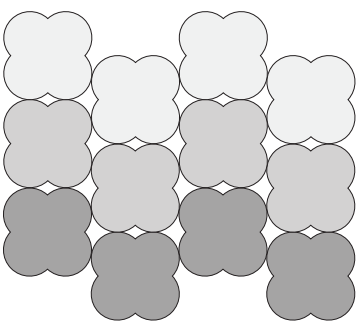

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010



Energetic vibe
A004 A012 A011




*2 sq.m. / Package



**BB09
WAVE**

15 Panels / 1 sq.m*

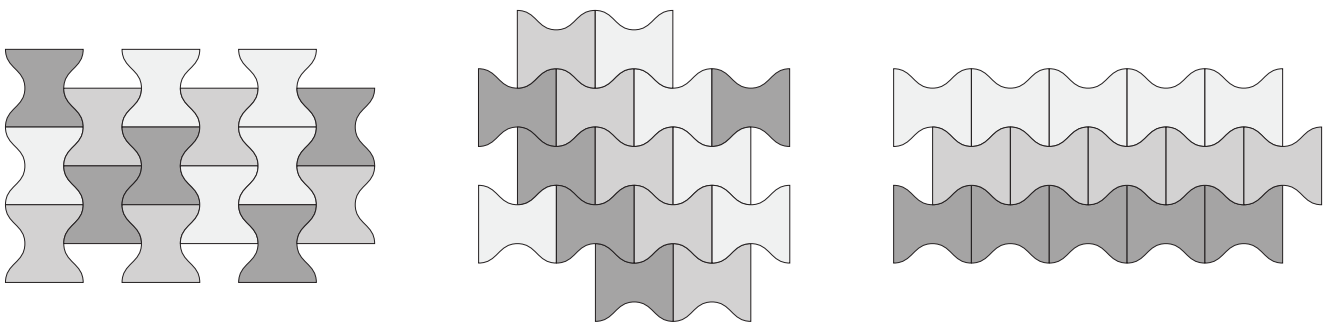

Simple & Modern Style
A005 A004 A002



Cozy & Minimal Style
A007 A006



Pop & Colorful Style
A016 A013 A010



Energetic vibe
A004 A012 A011



*2 sq.m. / Package

RT acoustic

BLOCK BEAT

AVAILABLE COLOUR

STANDARD



SOLO 9 mm.



Material : 100% Polyester
with min. 60% Recycled Content
Thickness : 9 mm. +/- 10%
Panel Size : 1220 x 2800 mm.
Weight : 1800 g/m²

SOLO 12 mm.



Material : 100% Polyester
with min. 60% Recycled Content
Thickness : 12 mm. +/- 10%
Panel Size : 1220 x 2800 mm.
Weight : 2400 g/m²



Flammability

EN 13501-1 : Class B-s1, d0

Color Fastness to Light

ISO 105-B02 : Rating 6-7

Emission Data

TVOC Emission Rate : 0.021 mg/m³
Formaldehyde Emission Rate : 2 µg/m³



Recycled
PET Fiber



Sound
Absorption



Low VOC
(Low Phenol &
Formaldehyde)



High Resistance
to Fire




Breathable
Panel

RT acoustic


 **BLOCK
BEAT**

INSTALLATION

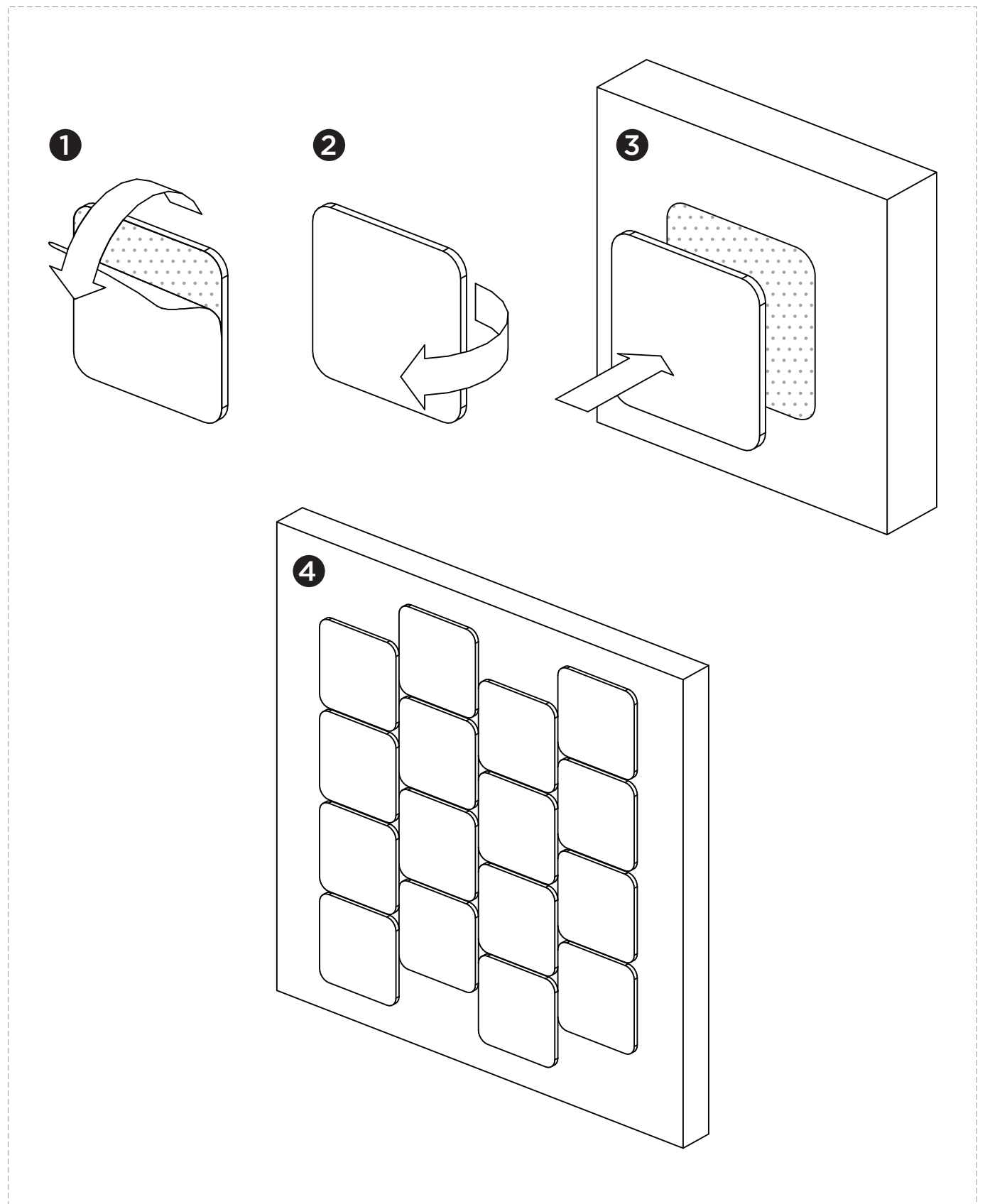


AVAILABLE PATTERNS

BB01 : COMB

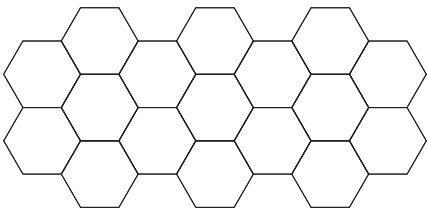


17 Panels / 1 sq.m*

BB02 : MOSAIC

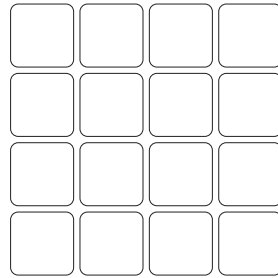


16 Panels / 1 sq.m*

BB03 : BOXSTEP

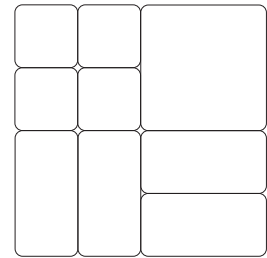


9 Panels / 1 sq.m*

BB04 : BRIX

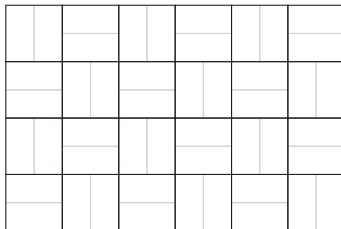


24 Panels / 1 sq.m*

BB05 : APEX

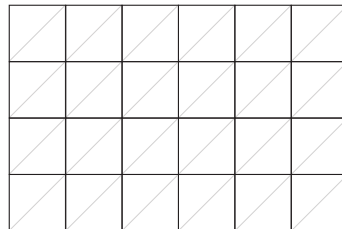


24 Panels / 1 sq.m*

BB06 : VERTEX

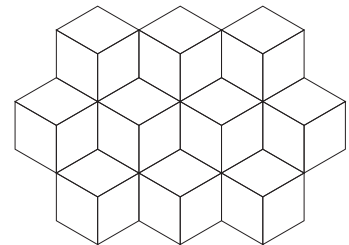


30 Panels / 1 sq.m*

BB07 : MESH

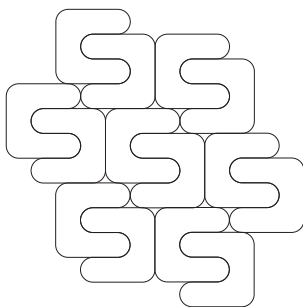


14 Panels / 1 sq.m*

BB08 : FLOW

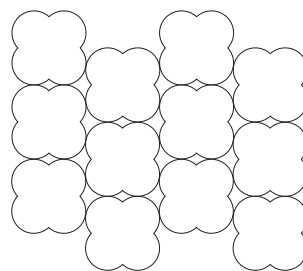

12 Panels / 1 sq.m*

BB09 : WAVE

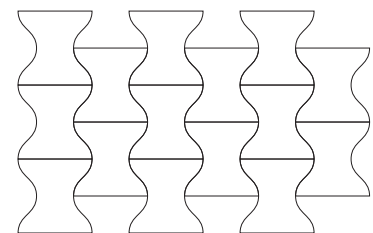

15 Panels / 1 sq.m*