



Simon|400

BECAUSE WORKPLACES
CHANGE EVERYDAY

simon

THE CONVENIENCE OF CONNECTING
HOW AND WHERE YOU WANT



reddot design award
winner 2018

NOT WANTING TO SETTLE DOWN IS A WAY OF SETTLING DOWN

Always going from one place to another is something that has been done since prehistoric times. This is a tendency that has re-emerged strongly in our working environment today.



Being able to work in the peace and quiet of a favourite corner and two hours later in the meeting room is like having a million offices rolled in one.

It means making a static routine more dynamic and functional. It means choosing where to sit according to the day, whether or not you need to concentrate, or where the sun is in the afternoon. It means choosing where to sit according to the agenda, meetings or what you need to get done today.

It means returning to your roots.
It means being yourself again.

Simon presents Simon 400; because the workplace changes every day.



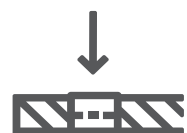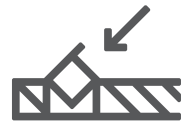

COMPACT

A CLEAN DESK TO FREE
YOUR MIND

Simon 400 was born with a single objective: **to make desks a totally free space where people can create without limits.**

To this end, all the pieces in the new collection take up as little space as possible on the desktop, both physically and visually.

Up to 23% more compact designs in which we eliminate wasted spaces to fully optimise your usable work area so that you can do your work with total freedom of movement, without anything getting in your way.









DESIGN

THE FREEDOM TO BE IN
HARMONY ANYWHERE

Being at ease in the workspace is essential to giving the best of oneself. That's why we have focused on every last detail in the new collection.

AN AESTHETIC BASED ON CLEAN LINES

Its austere lines and the clean design elements make **Simon 400** an elegant, minimalist and compact collection.

To achieve this, visible screws, the interior vertical lines between functions, and even the frame itself have been eliminated, making the attractive metal cover the only visible element of the piece.

INTEGRATED FINISHES

Simon 400 has two striking finishes: **black** and **white**.

Two options that integrate perfectly in any space to make you feel comfortable with your customers, your workers, your colleagues, in short, to make you feel that any space is yours.



FLEXIBILITY

SPACES OPEN TO CHANGE
FOR PEOPLE ON THE MOVE



Explore other ways of relating to your workspace; change, come alive and rediscover your usual space to see it with fresh eyes.

The dynamics of new formats of nomadic workers are now a global reality at all levels of business. A change that has given rise to much more agile spaces, where flexibility and hot-desking are taking their place in people's day-to-day working life.

Simon 400 is a collection designed to address these new needs in the workplace, an ecosystem in constant movement that requires more versatile configurations. To do this, our new collection adapts to your needs.





 
IN-DESK


Solutions designed for flush mounting on the desktop to free up as much space as possible so that desks can be used for whatever each individual wants to do.

Installing them in the desk and having a **cover** that conceals everything from **schuko sockets to USB chargers, RJ45 connectors for data and telephone, and multimedia connectors, means that they go virtually unnoticed.** Coming into view only when you need them.


The **metal cover** is noteworthy. It's an element with subtle finishes that doesn't seek the limelight but remains aligned with the design of the desk to integrate the schuko sockets and connectors for voice, data and multimedia in a natural way.


In addition, for meeting rooms that want even more, the in-desk solution is available in a **dual-access version**, multiplying the possibilities and facilitating its use from either side of the table. There's also a version with **sockets for individual connection** for tables, individual furniture or courtesy outlets applications.



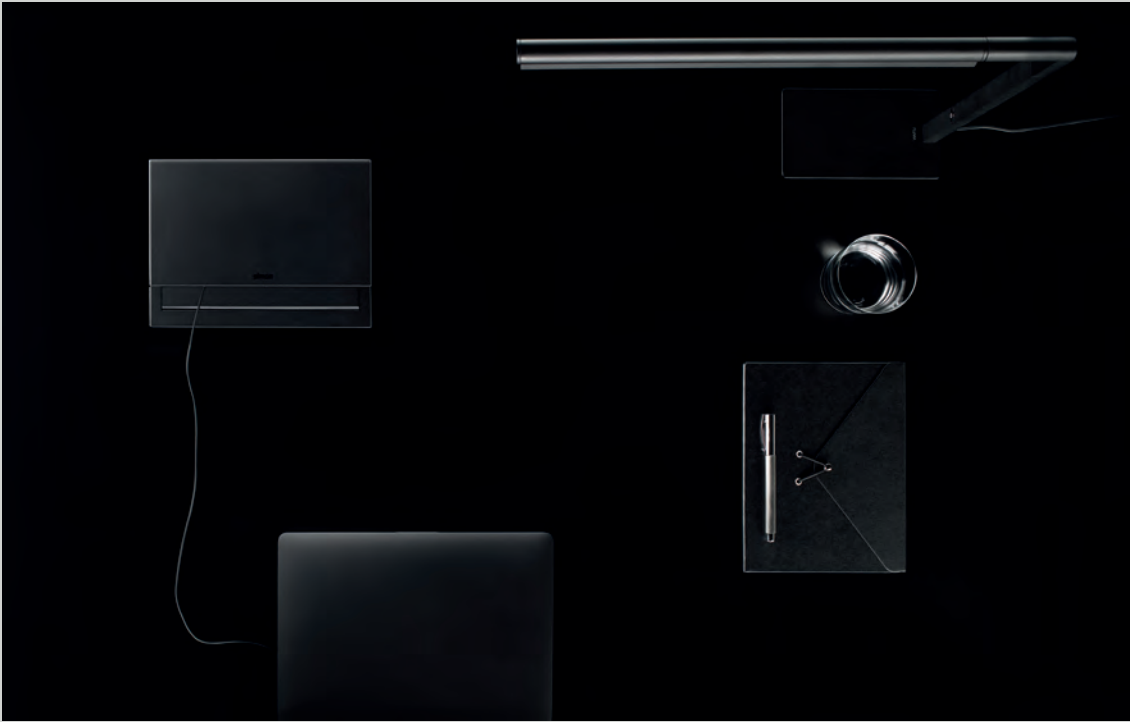

reddot design award
winner 2018

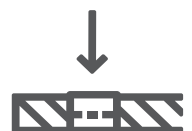


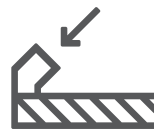



ON-DESK

With attractive, simple lines, these solutions facilitate the use of **power sockets, RJ45 voice and data connectors, USB chargers and multimedia connectors**, putting everything a worker needs in easy reach on the desktop.

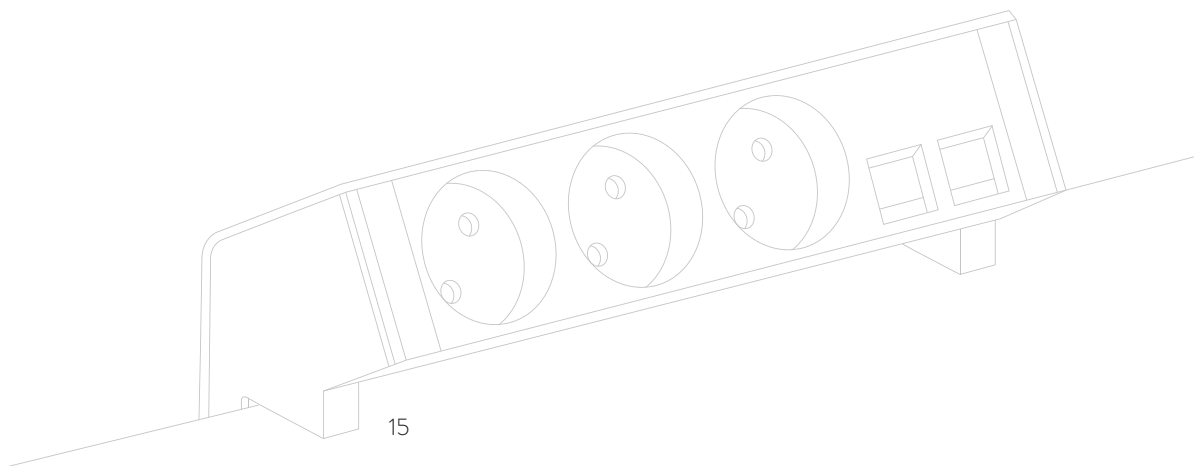

COMPOSITIONS

WHEN CHOOSING SIMON 400, YOU HAVE SEVERAL POSSIBILITIES ACCORDING TO YOUR NEEDS

First, the complete kit is supplied in a pre-set configuration of 3, 4, 5 or 6 modules that are **ready to install**.

These include USB chargers, power sockets and/or RJ45 voice and data sockets.

In addition, the customisable kit, also available in 3, 4, 5 or 6 modules, has a pre-configured part (schuko socket and/or USB charger) and free slots that allow for **customised configuration** of the following solutions: USB, HDMI, VGA+Minijack, 3 RCA, RJ45 or blind cover. These solutions are supplied separately.

The kits are supplied on a single reference, which includes the housing and profile with its sockets assembled and wired.

All to adapt to your way of life, optimising your space and your time.

RANGE

 
SOLUTIONS WITH 3, 4, 5, 6, 2x4 OR 2x6 MODULES



1 MODULE



3 MODULES



4 MODULES



 
2x4 MODULES




2x6 MODULES



5 MODULES



6 MODULES

 

COMPLETE KITS



1 MODULE



3 MODULES



4 MODULES



5 MODULES



6 MODULES

 


* Only for on-desk versions

CUSTOMISABLE KITS





4 MODULES









5 MODULES

  

6 MODULES

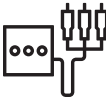

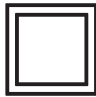 VGA + Minijack	 HDMI	 3 RCA	 USB	 RJ45	 TAPA CIEGA
---	---	--	--	---	---

QUICK AND SIMPLE INSTALLATION


WE THINK ABOUT YOUR COMFORT

Simon 400 has been designed for quick and easy installation. No need to duck under the table. Both the schuko sockets and the USB chargers are supplied pre-wired so that they only need connection to a quick connector to supply them with power without having to cut or strip wires.


In the customisable kits, the plates clip directly onto the profile to save time, without the need for tools or adapter frames.

7 INSTALLATION ADVANTAGES

- ① **Comfort.**
Installation always from the top.

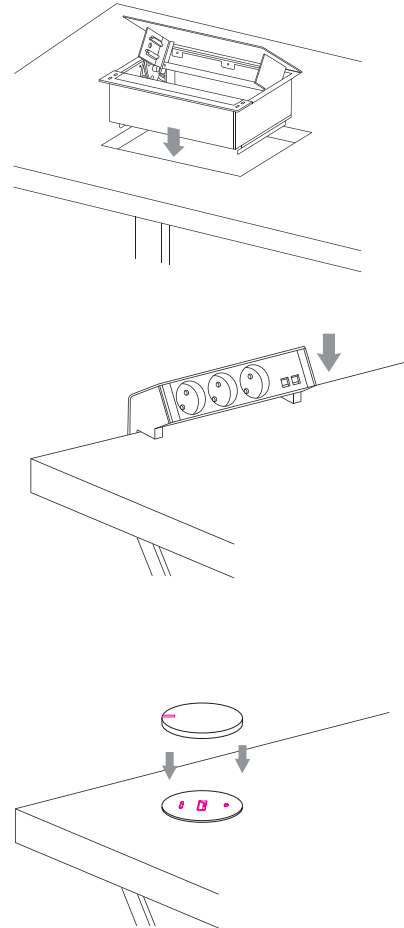


- ② **Speed.**
Pre-wired schuko sockets and USB chargers and with Wieland® quick connection.

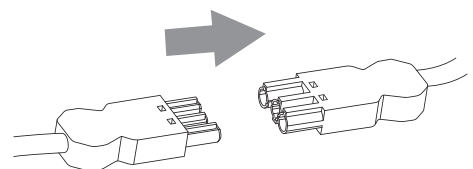


3 High-speed voice and data.

Optimal bending radius for data cables, as the connection is made through the rear window.

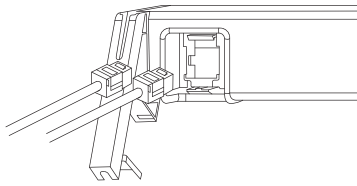


4 No special tools required.

Direct clipping of voice, data and multimedia plates.

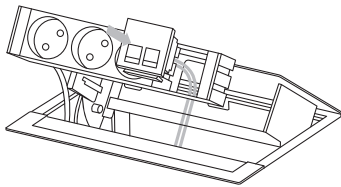


5 Transmission fidelity.

Female-to-female multimedia connectors guarantee correct signal transmission.

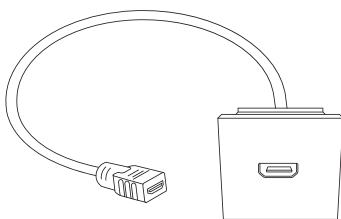


6 Hinged cable organiser.

Add a hinged cable organiser to your installation to protect your cabling and allow for more flexible connectivity.

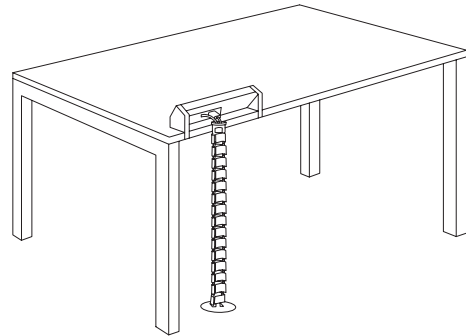

7 Distribution boxes.


Make your installation more complete and flexible with the easy-to-install distribution boxes of up to 5 poles.

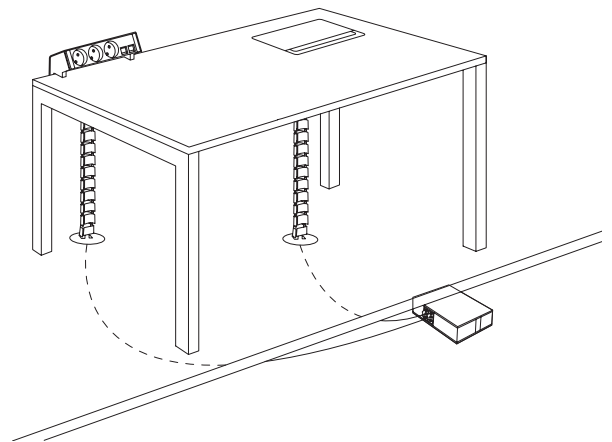






WE OFFER YOU ALL THE ALTERNATIVES SO THAT YOU CAN CHOOSE HOW TO CONNECT

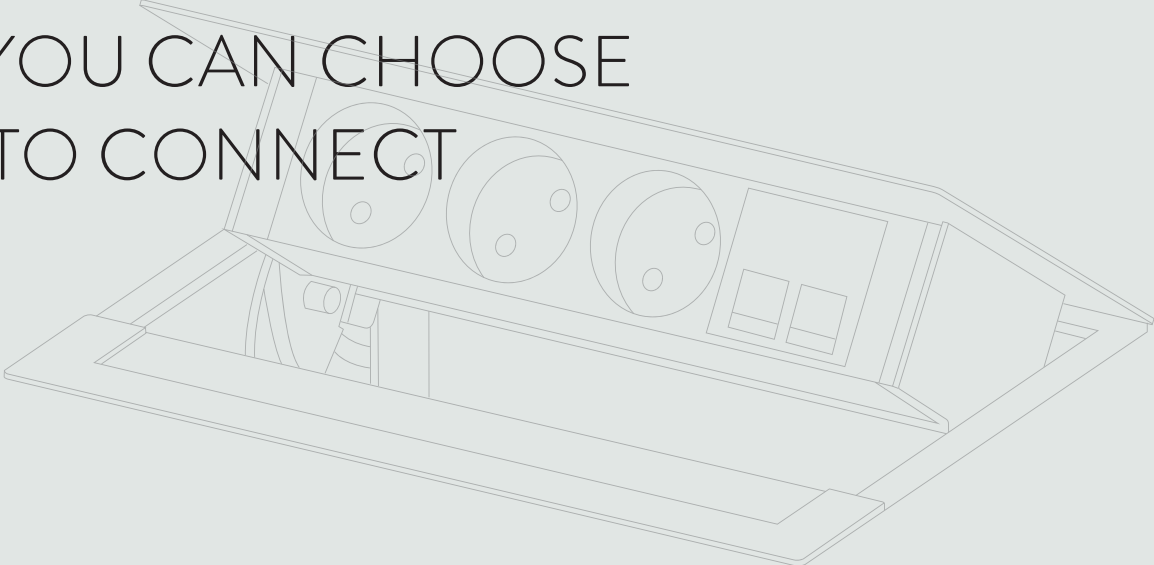


PRIVATE OFFICE
p. 22-23




SMALL MEETING ROOM
p. 24-25

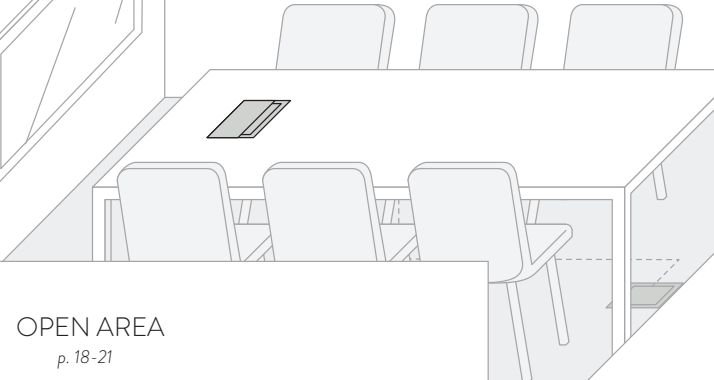



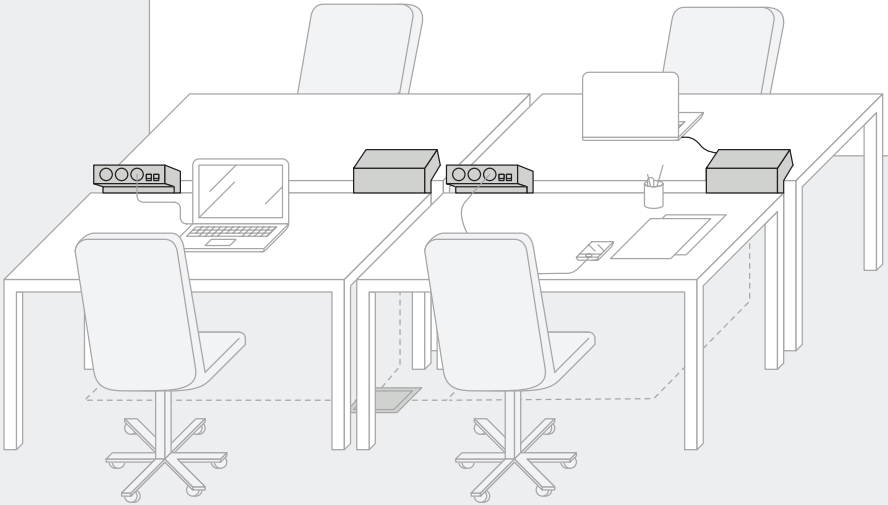

OPEN AREA
p. 18-21

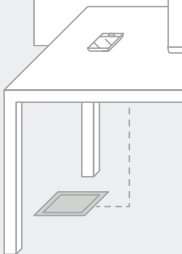


PRIV



	Open area	Private office	Meeting room with multimedia capability	Large meeting room with multimedia capability	Collaborative co-working spaces	Cable organiser
 On-desk	● p. 24-25	● p. 28			● p. 34	● p. 36
 In-desk	● p. 26-27	● p. 29	● p. 30		● p. 33	● p. 36
 In-desk with dual opening			● p. 31	● p. 32		● p. 36
 Individual socket			● p. 29	● p. 29	● p. 29	● p. 36
Distribution boxes	● p. 37	● p. 37	● p. 37	● p. 37	● p. 37	● p. 36


LARGE MEETING ROOM
p. 26

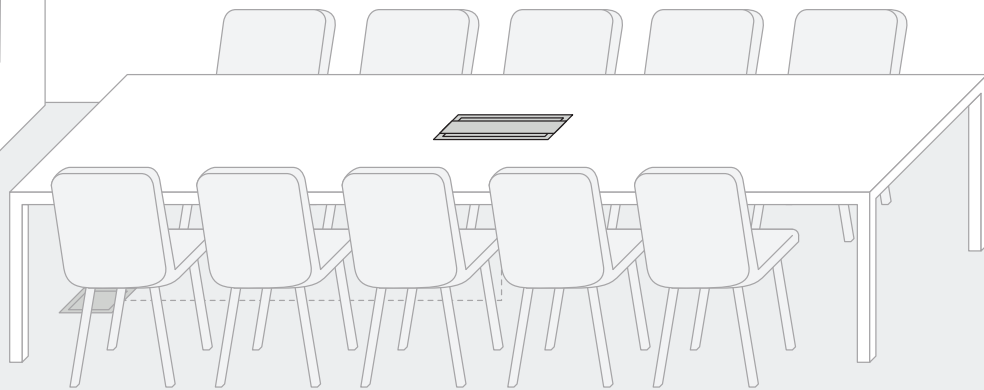

PRIVATE OFFICE
p. 22-23



CO-WORKING
p. 27-28

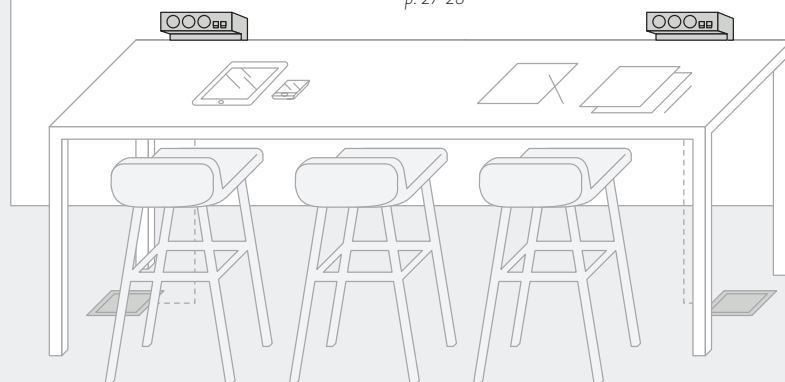

ON-DESK IN OPEN AREA

On-desk solution for electrification of furniture. Consisting of 3 230 V schuko sockets and plate for 2 RJ45 connectors. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box with 1 patch cord.



2 WORKSTATIONS



STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
42403020-13X	On-desk kit with 3 schuko sockets and 2 windows for RJ45 connectors	2
CL61U	RJ45-RJ45 patch cord, 1 m	4

STEP 2: ELECTRIFICATION OF THE FLOOR


VIA FLOOR BOX

52050103-035	Floor box with adjustable depth from 90 mm to 120 mm with 3 double modules	1
52053103-035	Cover for box with 3 double modules	1
50010432-030	Double socket -outlet with quick connection with white LED	1
50000085-030	Plate for 1 RJ45 connector with dust shutter	4
CR6020/14	3-pole female-Schuko patch cord. 2 m of halogen-free cable. Cross-section 2x2.5 mm ²	2
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX

49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female patch cord. 4 m. of halogen-free cable. Cross-section 2x2.5mm ²	2
49204004-13X	Cable organiser for 4 workstations	1

3 WORKSTATIONS

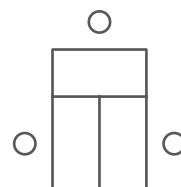

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
42403020-13X	On-desk kit with 3 schuko sockets and 2 windows for RJ45 connectors	3
CL61U	RJ45-RJ45 patch cord, 1 m	6


STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX


52050106-035	Floor box with adjustable depth from 90 mm to 120mm with 6 double modules	1
52053106-035	Cover for box with 6 double modules	1
50010432-030	Double socket -outlet with quick connection with white LED	2
50000085-030	Plate for 1 RJ45 connector with dust shutter	6
50010800-030	Individual blind plate	2
CR6020/14	3-pole female-Schuko patch cord. 2m. of halogen-free cable. Cross-section 2x2.5mm ²	3
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX


49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female patch cord. 4 m. of halogen-free cable. Cross-section 2x2.5 mm ²	3
49204004-13X	Cable organiser for 4 workstations	1

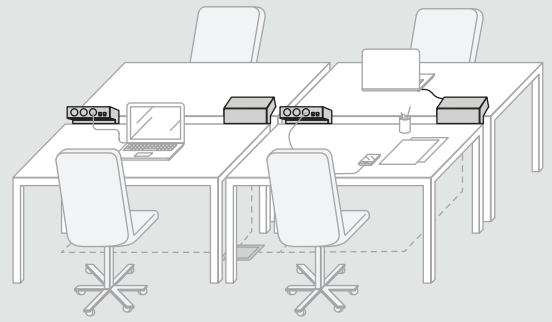

4 WORKSTATIONS

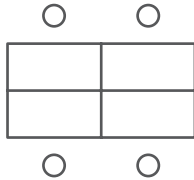

6 WORKSTATIONS

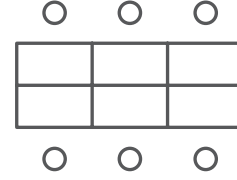

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
42403020-13X	On-desk kit with 3 schuko sockets and 2 windows for RJ45 connectors	4
CL61U	RJ45-RJ45 patch cord, 1 m	8

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
42403020-13X	On-desk kit with 3 schuko sockets and 2 windows for RJ45 connectors	6
CL61U	RJ45-RJ45 patch cord, 1 m	12

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050106-035	Floor box with adjustable depth from 90 mm to 120 mm with 6 double modules	1
52053106-035	Cover for box with 6 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	2
50000085-030	Plate for 1 RJ45 connector with dust shutter	8
CR6020/14	3-pole female-Schuko patch cord. 2 m. of halogen-free cable. Cross-section 2x2.5mm ²	4
49204004-13X	Cable organiser for 4 workstations	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050103-035	Floor box with adjustable depth from 90 mm to 120 mm with 3 double modules	1
52053103-035	Cover for box with 3 double modules	1
52050106-035	Floor box with adjustable depth from 90 mm to 120mm with 6 double modules	1
52053106-035	Cover for box with 6 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED.	3
50000085-030	Plate for 1 RJ45 connector with dust shutter	12
CR6020/14	3-pole female-schuko quick-connection patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5 mm ²	6

VIA DISTRIBUTION BOX

49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female patch cord. 4 m. of halogen-free cable. Cross-section 2x2.5mm ²	4
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX

49116000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 6 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	2
CR2050/14	3-pole male-female quick-connection patch cord. 5 metres of halogen-free cable. Cross-section 3x2.5mm ²	6

IN-DESK IN OPEN AREA


In-desk solution with cover for electrification of furniture. Consisting of 1 double USB charger, 3 230 V schuko sockets and 1 free slot for installing 1 plate for RJ45 or multimedia plates. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box with 1 patch cord.



2 WORKSTATIONS



3 WORKSTATIONS

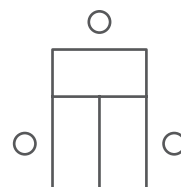

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
44523000-13X	In-desk kit with cover with 1 2 USB charger (2.1 A), 3 schuko sockets and 1 free slot	2
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	2
CL61U	RJ45-RJ45 patch cord, 1 m	4

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
44523000-13X	In-table kit with cover with 1 2 USB charger (2.1A), 3 schuko sockets and 1 free slot	3
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	3
CL61U	RJ45-RJ45 patch cord, 1 m	6

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050103-035	Floor box with adjustable depth from 90 mm to 120 mm with 3 double modules	1
52053103-035	Cover for box with 3 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	1
50000085-030	Plate for 1 RJ45 connector with dust shutter	4
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	2
49204004-13X	Cable organiser for 4 workstations	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX


52050106-035	Floor box with adjustable depth from 90 mm to 120 mm with 6 double modules	1
52053106-035	Cover for box with 6 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	2
50000085-030	Plate for 1 RJ45 connector with dust shutter	6
50010800-030	Individual blind plate	2
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	3
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX


49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	2
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX


49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	3
49204004-13X	Cable organiser for 4 workstations	1

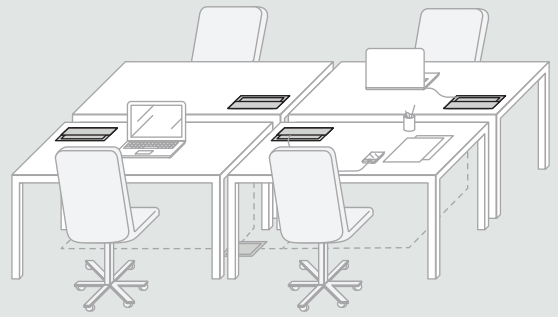

4 WORKSTATIONS

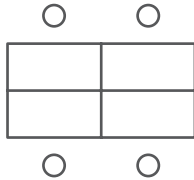

6 WORKSTATIONS

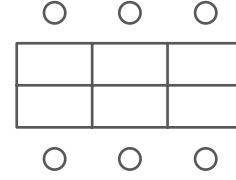

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
44523000-13X	In-table kit with cover with 12 USB charger (2.1A), 3 schuko sockets and 1 free slot	4
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	4
CL61U	RJ45-RJ45 patch cord, 1 m	8

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
44523000-13X	In-table kit with cover with 12 USB charger (2.1A), 3 schuko sockets and 1 free slot	6
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	6
CL61U	RJ45-RJ45 patch cord, 1 m	12

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050106-035	Floor box with adjustable depth from 90 mm to 120 mm with 6 double modules	1
52053106-035	Cover for box with 6 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	2
50000085-030	Plate for 1 RJ45 connector with dust shutter	8
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	4
49204004-13X	Cable organiser for 4 workstations	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050103-035	Floor box with adjustable depth from 90 mm to 120 mm with 3 double modules	1
52053103-035	Cover for box with 3 double modules	1
52050106-035	Floor box with adjustable depth from 90 mm to 120 mm with 6 double modules	1
52053106-035	Cover for box with 6 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	3
50000085-030	Plate for 1 RJ45 connector with dust shutter	12
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	6

VIA DISTRIBUTION BOX


49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	4
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX

49116000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 6 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	2
CR2050/14	3-pole male-female quick-connect patch cord. 5 metres of halogen-free cable. Cross-section 3x2.5mm ²	6

ON-DESK IN PRIVATE OFFICE

On-desk solution for electrification of furniture. Consisting of 1 double USB charger, 3 230 V schuko sockets and plate for 2 RJ45 connectors. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box with 1 patch cord.

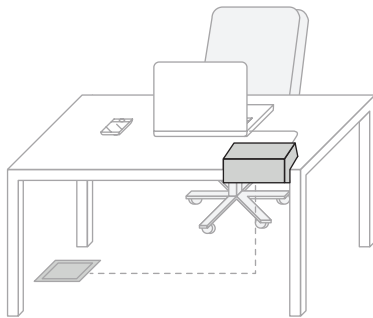

1 WORKSTATION



STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
42523020-13X	On-desk kit pre-wired with 1 2xUSB charger (2.1A), 3 schuko sockets and plate for 2 RJ45 connectors	1
CL61U	RJ45-RJ45 patch cord, 1 m	2
49204004-13X	Cable organiser for 4 workstations	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050102-035	Floor box with adjustable depth from 90 mm to 120 mm with 2 double modules	1
52053102-035	Cover for box with 2 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	1
50000085-030	Plate for 1 RJ45 connector with dust shutter	2
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	1


VIA DISTRIBUTION BOX

49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	1
49204004-13X	Cable organiser for 4 workstations	1

IN-DESK

IN PRIVATE OFFICE

In-desk solution with cover for electrification of furniture. Consisting of 1 double USB charger, 3 230V schuko sockets and 1 free slot for installing 1 plate for 2 RJ45 connectors. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box with 1 patch cord.

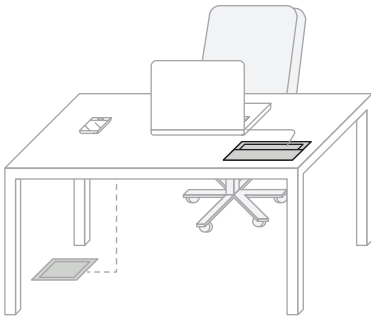

reddot design award
winner 2018



1 WORKSTATION



STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
OPTION 1		
44523000-13X	In-table kit with cover with 1 2 USB charger (2.1A), 3 schuko sockets and 1 free slot	1
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	1
CL61U	RJ45-RJ45 patch cord, 1 m	2
OPTION 2		
43101002-03X	Individual socket connection kit with schuko socket.	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050102-035	Floor box with adjustable depth from 90 mm to 120 mm with 2 double modules	1
52053102-035	Cover for box with 2 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	1
50000085-030	Plate for 1 RJ45 connector with dust shutter	2
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	1

VIA DISTRIBUTION BOX


49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	1

IN-DESK


IN A MEETING ROOM WITH MULTIMEDIA CAPABILITY



In-desk solution with cover for meeting rooms. Consisting of 3 230 V schuko sockets and 3 multimedia free slots for installing 1 plate for 2 RJ45 connectors, 1 plate with HDMI connector and 1 plate with VGA and minijack connectors. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box by means of a patch cord.

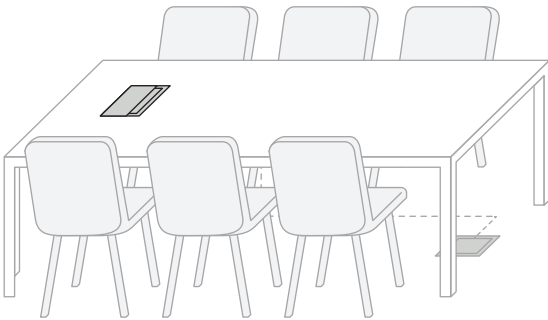

6 TO 12 WORKSTATIONS

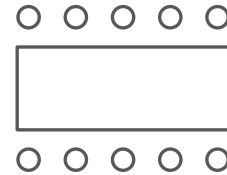

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
44603000-13X	In-desk kit with cover with 3 schuko sockets and 3 free slots	1
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	1
40001194-03X	HDMI plate with female-female connector patch cord	1
40000191-03X	Plate with VGA + minijack female-female connectors with patch cords	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050102-035	Floor box with adjustable depth from 90 mm to 120 mm with 2 double modules	1
52053102-035	Cover for box with 2 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	1
50000085-030	Plate for 1 RJ45 connector with dust shutter	2
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	2
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX

49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	1
49204004-13X	Cable organiser for 4 workstations	1



reddot design award
winner 2018

IN-DESK



WITH DUAL-OPENING COVER

IN MEETING ROOM WITH

MULTIMEDIA CAPABILITY



In-desk solution with dual-opening cover for meeting rooms. Consisting of 4 230V schuko sockets and 4 free slots for 2 plates for 2 RJ45 connectors, 1 plate with HDMI connector and 1 plate with VGA and minijack connectors. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box with 1 patch cord.

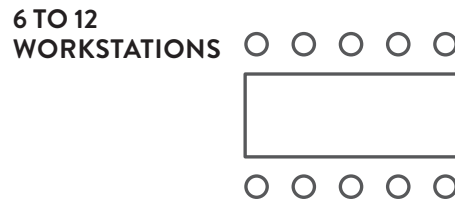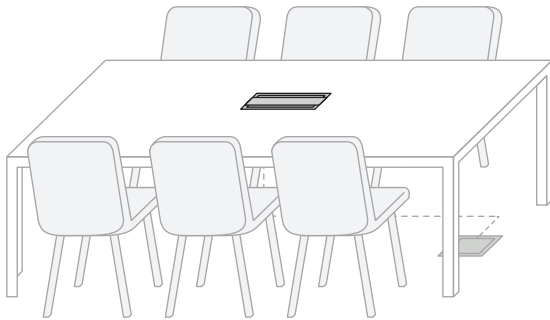

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
46402000-13X	In-table kit with single cover with opening on both sides with 4 schuko sockets and 4 free slots	1
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	2
40001194-03X	HDMI plate with female-female connector patch cord	1
40000191-03X	Plate with VGA + minijack female-female connectors with patch cords	1
CR2030/14	3-pole male-female quick-connection patch cord. 3 metres of halogen-free cable. Cross-section 3x2.5mm ²	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050103-035	Floor box with adjustable depth from 90 mm to 120 mm with 3 double modules	1
52053103-035	Cover for box with 3 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	1
50000085-030	Plate for 1 RJ45 connector with dust shutter	4
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	1

VIA DISTRIBUTION BOX


49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	1

IN-DESK


WITH DUAL-OPENING COVER
IN LARGE MEETING ROOM WITH
MULTIMEDIA CAPABILITY



In-desk solution with dual-opening cover for large meeting rooms. Consisting of 8 230 V schuko sockets and 4 free slots for 2 plates for 2 RJ45 connectors, 1 plate with HDMI connector and 1 plate with VGA and minijack connectors. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box with 1 patch cord.

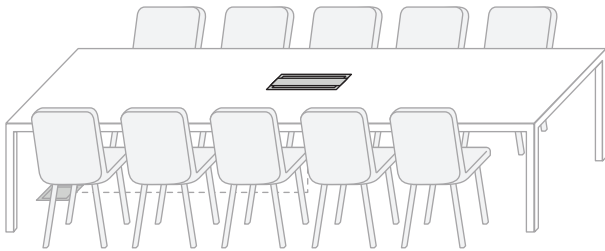

**12 A 24
WORKSTATIONS**

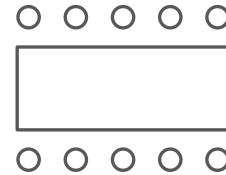

STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
46604000-13X	In-desk kit with single cover with opening on both sides with 8 schuko sockets and 4 free slots	1
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	2
40001194-03X	HDMI plate with female-female connector patch cord	1
0000191-03X	Plate with VGA + minijack female-female connectors with patch cords	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050104-035	Floor box with adjustable depth from 90 mm to 120 mm with 4 double modules	1
52053104-035	Cover for box with 4 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	2
50000085-030	Plate for 1 RJ45 connector with dust shutter	4
CR6020/14	3-pole female-schuko quick-connection patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	1
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX

49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	2
49204004-13X	Cable organiser for 4 workstations	1




reddot design award
winner 2018

IN-DESK

IN COLLABORATIVE SPACES

In-desk solution with cover for collaborative space. Consisting of 1 double USB charger, 2 230 V schuko sockets and 1 free slot for installing 1 plate for 2 RJ45 connectors and 1 plate with HDMI connector. Electrified via Wieland® 3-pole quick connection to electrical distribution box or floor box with 1 patch cord.

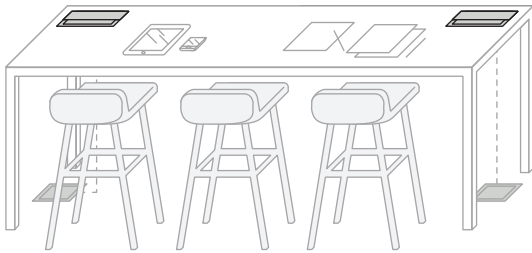

CO-WORKING



STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
44422000-13X	In-table kit with cover, with 1 2xUSB charger (2.1 A), 2 schuko sockets and 1 free slot	1
40000089-03X	Flat plate with dust shutter for 2 RJ45 connectors	1
40001194-03X	HDMI plate with female-female connector patch cord	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX


52050102-035	Floor box with adjustable depth from 90 mm to 120 mm with 2 double modules	1
52053102-035	Cover for box with 2 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	1
50000089-030	Flat plate with dust shutter for 2 RJ45 connectors	2
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5 mm ²	1

VIA DISTRIBUTION BOX

49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	1

ON-DESK IN COLLABORATIVE SPACES

On-desk solution for co-working space. Consisting of 1 double USB charger, 3 230 V schuko sockets and 1 plate for 2 RJ45 connectors. Electrified by Wieland® 3-pole quick connection to electrical distribution box or to floor box with 1 patch cord.

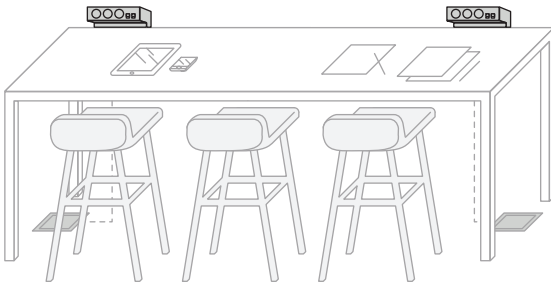

CO-WORKING



STEP 1: ELECTRIFICATION OF FURNITURE

Reference	Description	Units
42523020-13X	On-desk kit pre-wired with 12xUSB charger (2.1 A), 3 schuko sockets and 2 windows for RJ45 connectors	1

STEP 2: ELECTRIFICATION OF THE FLOOR

VIA FLOOR BOX

52050102-035	Floor box with adjustable depth from 90 mm to 120 mm with 2 double modules	1
52053102-035	Cover for box with 2 double modules	1
50010432-030	Double socket-outlet with quick connection with white LED	1
50000089-030	Flat plate with dust shutter for 2 RJ45 connectors	2
CR6020/14	3-pole female-Schuko quick-connect patch cord. 2 metres of halogen-free cable. Cross-section 3x2.5mm ²	1
49204004-13X	Cable organiser for 4 workstations	1

VIA DISTRIBUTION BOX


49114000-039	Distribution box regular circuit with 1 3-pole Wieland® GST18i input and 4 3-pole Wieland® GST18i outputs	1
52055000-030	Cable outlet Ø102 mm for raised access floor	1
CR2040/14	3-pole male-female quick-connect patch cord. 4 metres of halogen-free cable. Cross-section 3x2.5mm ²	1
49204004-13X	Cable organiser for 4 workstations	1



CABLE ORGANISER



2 TO 6
WORKSTATIONS

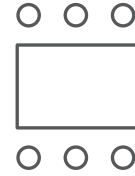


Workstations	Kit units	Cross-section	
2	8	660 mm ²	
2 or 3	12	990 mm ²	
4	4	2x660 mm ²	
6	6	2x990 mm ²	

DISTRIBUTION BOXES




Without UPS

- Box 1e/3s
- Box 1e/2s
(if not linked)

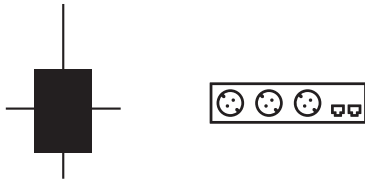


With UPS


- Box 1+1e/3+3s
- Box 1+1e/2+2s
(if not linked)

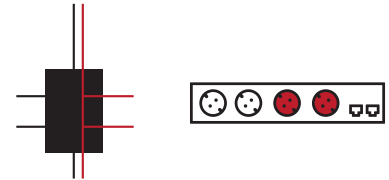


- Box 1e/4s
- Box 1e/3s
(if not linked)

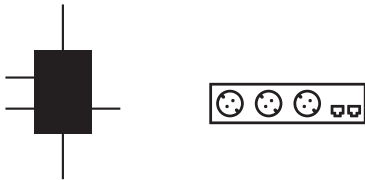


- Box 1+1e/4+4s
- Box 1+1e/3+3s
(if not linked)

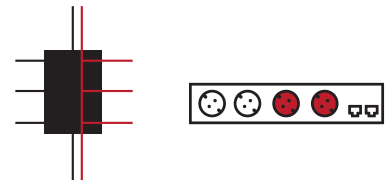


- Box 1e/5s
- Box 1e/4s
(if not linked)

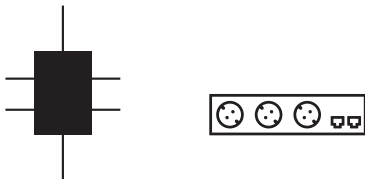


- Box 1+1e/5+5s
- Box 1+1e/4+4s
(if not linked)

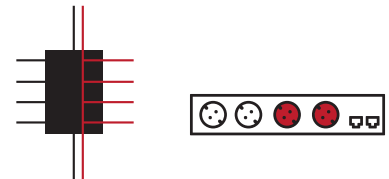

- Box 1e/7s
- Box 1e/6s
(if not linked)

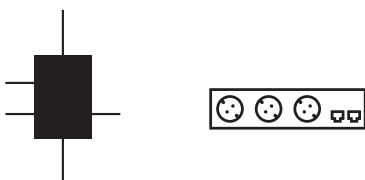

- 2 boxes 1e/7s
- 2 boxes 1e/6s
(if not linked)

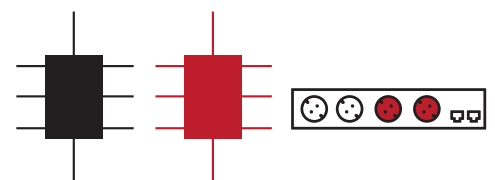





Index of references

KITS

Complete on-desk kits	42
Customisable on-desk kits	44
Complete in-desk kits with cover	46
Customisable in-desk kits with cover	47
Complete in-desk kits with dual opening cover	50
Customisable in-desk kits with dual opening cover	51
Complete individual connection socket kits	53

VOICE, DATA AND MULTIMEDIA

Voice and data plates for RJ45 connectors	54
Voice and data compatibility plates with RJ45 connectors	55
RJ45 connectors	56
Voice and data patch cords	57
Multimedia plates with connectors	58

MISCELLANEOUS

Blind plates	59
Quick connection systems for electrical networks	59
Hinged cable organiser	61
Cable outlet	61


DISTRIBUTION BOXES	62
--------------------	----


Kits


FINISHES ▶ -130
White -138
Black


COMPLETE ON-DESK KITS


WITH Schuko sockets + VOICE AND DATA PLATES FOR RJ45 CONNECTORS

REFERENCE	DESCRIPTION
 42403020 -130 -138	Complete on-desk kit pre-wired with 3 schuko sockets and 2 windows for RJ45 connectors


REFERENCE	DESCRIPTION
 42504020 -130 -138	Complete on-desk kit pre-wired with 4 schuko sockets and 2 windows for RJ45 connectors


REFERENCE	DESCRIPTION
 42604040 -130 -138	Complete on-desk kit pre-wired with 4 schuko sockets and 4 windows for RJ45 connectors


REFERENCE	DESCRIPTION
 42502220 -130 -138	Complete on-desk kit pre-wired with 2 schuko sockets, 2 UPS sockets and windows for 2 RJ45 connectors supplied with 2 patch cords

REFERENCE	DESCRIPTION
 42602240 -130 -138	Complete on-desk kit pre-wired with 2 schuko sockets, 2 UPS sockets and windows for 4 RJ45 connectors supplied with 2 patch cords


WITH SCHUKO SOCKETS


REFERENCE	DESCRIPTION
 42404000 -130 -138	Complete on-desk kit pre-wired with 4 schuko sockets


REFERENCE	DESCRIPTION
 42505000 -130 -138	Complete on-desk kit pre-wired with 5 schuko sockets

REFERENCE	DESCRIPTION
 42606000 -130 -138	Complete on-desk kit pre-wired with 6 schuko sockets


WITH USB CHARGER + SCHUKO SOCKETS


REFERENCE	DESCRIPTION
 42322000 -130 -138	Complete on-desk kit with 1 2xUSB charger (2.1 A) and 2 schuko sockets

REFERENCE	DESCRIPTION
 42423000 -130 -138	Complete on-desk kit with 1 2xUSB charger (2.1A) and 3 schuko sockets

REFERENCE	DESCRIPTION
 42332000 -130 -138	Complete on-desk kit with 1 USB A+C charger and 2 schuko sockets


WITH USB CHARGER + SCHUKO SOCKETS + VOICE & DATA PLATES FOR RJ45 CONNECTORS

REFERENCE	DESCRIPTION
 42523020 -130 -138	Complete on-desk kit pre-wired with 1 2xUSB charger (2.1 A), 3 schuko sockets and 2 windows for RJ45 connectors


REFERENCE	DESCRIPTION
 42533020 -130 -138	Complete on-desk kit with USB A+C charger, 3 schuko sockets and plate for 2 RJ45 connectors

CUSTOMISABLE ON-DESK KITS


WITH 1 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA


REFERENCE	DESCRIPTION	FREE SLOTS
 42401000 -130 -138	Customisable on-desk kit pre-wired with 1 schuko sockets and 3 free slots for configurable solutions	3


REFERENCE	DESCRIPTION	FREE SLOTS
 42501000 -130 -138	Customisable on-desk kit pre-wired with 1 schuko sockets and 4 free slots for configurable solutions	4

REFERENCE	DESCRIPTION	FREE SLOTS
 42601000 -130 -138	Customisable on-desk kit pre-wired with 1 schuko sockets and 5 free slots for configurable solutions	5


WITH 2 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA


REFERENCE	DESCRIPTION	FREE SLOTS
 42402000 -130 -138	Customisable on-desk kit pre-wired with 2 schuko sockets and 2 free slots for configurable solutions	2


REFERENCE	DESCRIPTION	FREE SLOTS
 42502000 -130 -138	Customisable on-desk kit pre-wired with 2 schuko sockets and 3 free slots for configurable solutions	3

REFERENCE	DESCRIPTION	FREE SLOTS
 42602000 -130 -138	Customisable on-desk kit pre-wired with 2 schuko sockets and 4 free slots for configurable solutions	4


WITH 3 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA

REFERENCE	DESCRIPTION	FREE SLOTS
 42403000 -130 -138	Customisable on-desk kit pre-wired with 3 schuko sockets and 1 free slot for a configurable solution	1

REFERENCE	DESCRIPTION	FREE SLOTS
 42503000 -130 -138	Customisable on-desk kit pre-wired with 3 schuko sockets and 2 free slots for configurable solutions	2


REFERENCE	DESCRIPTION	FREE SLOTS
 42603000 -130 -138	Customisable on-desk kit pre-wired with 3 schuko sockets and 3 free slots for configurable solutions	3

WITH 4 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA


REFERENCE	DESCRIPTION	FREE SLOTS
 42504000 -130 -138	Customisable on-desk kit pre-wired with 4 schuko sockets and 1 free slot for a configurable solution	1


REFERENCE	DESCRIPTION	FREE SLOTS
 42604000 -130 -138	Customisable on-desk kit pre-wired with 4 schuko sockets and 2 free slots for configurable solutions	2


WITH 5 SCHUKO SOCKETS + FREE SLOT FOR VOICE, DATA AND MULTIMEDIA


REFERENCE	DESCRIPTION	FREE SLOTS
 42605000 -130 -138	Customisable on-desk kit pre-wired with 5 schuko sockets and 1 free slot for a configurable solution	1

WITH USB CHARGER + SCHUKO SOCKETS + FREE SLOT FOR VOICE, DATA AND MULTIMEDIA

REFERENCE	DESCRIPTION	FREE SLOTS
 42422000 -130 -138	Customisable on-desk kit with 1 2xUSB charger (2.1 A), 2 schukos and 1 free slot for a configurable solution	1

REFERENCE	DESCRIPTION	FREE SLOTS
 42523000 -130 -138	Customisable on-desk kit with 1 2xUSB charger (2.1A), 3 schukos and 1 free slot for a configurable solution	1

REFERENCE	DESCRIPTION	FREE SLOTS
 42623000 -130 -138	Customisable on-desk kit with 1 2xUSB charger (2.1 A), 3 schukos and 2 free slots for configurable solutions	2

REFERENCE	DESCRIPTION	FREE SLOTS
 42624000 -130 -138	Customisable on-desk kit pre-wired with 1 2xUSB charger (2.1 A), 4 schukos, 1 free slot for a configurable solution	1

REFERENCE	DESCRIPTION	FREE SLOTS
 42432000 -130 -138	Customisable on-desk kit with 1 USB A+C charger, 2 schukos and 1 free slot for a configurable solution	1

COMPLETE IN-DESK KITS WITH COVER



WITH SCHUKO SOCKETS

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
  44404000 -130 -138	Complete in-desk kit with cover, pre-wired with	Brush
45404000 -130 -138	4 schuko sockets	Metal fin

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
  44505000 -130 -138	Complete in-desk kit with cover, pre-wired with	Brush
45505000 -130 -138	5 schuko sockets	Metal fin

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
  44606000 -130 -138	Complete in-desk kit with cover, pre-wired with	Brush
45606000 -130 -138	6 schuko sockets	Metal fin

WITH USB CHARGER + SCHUKO SOCKETS

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
  44423000 -130 -138	Complete in-desk kit with cover, pre-wired with	Brush
45423000 -130 -138	1 2xUSB charger (2.1 A) and 3 schuko sockets	Metal fin

WITH 3 Schuko sockets + VOICE AND DATA PLATES FOR RJ45 CONNECTORS

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
  44403020 -130 -138	Complete in-desk kit with cover, pre-wired with	Brush
45403020 -130 -138	3 schuko sockets and plate for 2 RJ45 connectors	Metal fin

WITH 4 SCHUKO SOCKETS + VOICE AND DATA PLATES FOR RJ45 CONNECTORS

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
  44504020 -130 -138	Complete in-desk kit with cover, pre-wired with	Brush
45504020 -130 -138	4 schuko sockets and plate for 2 RJ45 connectors	Metal fin

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
44502220 -130 -138	Complete in-desk kit with cover, pre-wired with 2 schuko sockets, 2 UPS sockets and plate for 2 RJ45 connectors	Brush
45502220 -130 -138		Metal fin

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
44604040 -130 -138	Complete in-desk kit with cover, pre-wired with 4 schuko sockets and plate for 4 RJ45 connectors	Brush
45604040 -130 -138		Metal fin

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
44602240 -130 -138	Complete in-desk kit with cover, pre-wired with 2 schuko sockets, 2 UPS sockets and plate for 4 RJ45 connectors	Brush
45602240 -130 -138		Metal fin

WITH USB CHARGER + SCHUKO SOCKETS + VOICE AND DATA PLATES FOR RJ45 CONNECTORS

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
44523020 -130 -138	Complete in-desk kit with cover, pre-wired with 1 2xUSB charger (2.1 A), 3 schuko sockets and plate for 2 RJ45 connectors	Brush
45523020 -130 -138		Metal fin

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
44533020 -130 -138	Complete in-desk kit with cover, brush and USB A+C charger, 3 schuko sockets and plate for 2 RJ45 connectors	Brush

CUSTOMISABLE IN-DESK KITS WITH COVER

WITH USB CHARGER + SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44422000 -130 -138	Customisable in-desk kit with cover, pre-wired with 1 2xUSB charger (2.1 A), 2 schuko sockets and 1 free slot for a configurable solution	Brush	1
45422000 -130 -138		Metal fin	

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44432000 -130 -138	Customisable in-desk kit with cover, pre-wired with 1 USB A+C charger, 2 schuko sockets and 1 free slot for a configurable solution	Brush	1

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44523000 -130 -138 -133	Customisable in-desk kit with cover, pre-wired with 1 2xUSB charger (2.1 A), 3 schuko sockets and 1 socket for configurable solution	Brush	1
45523000 -130 -138 -133		Metal fin	

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44533000 -130 -138	Customisable in-desk kit with cover and brush, pre-wired with 1 USB A+C charger, 3 schuko sockets and 1 socket for configurable solution	Brush	1

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44623000 -130 -138 -133	Customisable in-desk kit with cover, pre-wired with 1 2xUSB charger (2.1 A), 3 schuko sockets and 2 sockets for configurable solution	Brush	2
45623000 -130 -138 -133		Metal fin	

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44633000 -130 -138 -133	and 2 sockets for configurable solution	Brush	2

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44624000 -130 -138	Customisable in-desk kit with cover, pre-wired with 1 2xUSB charger (2.1 A), 4 schuko sockets and 1 free slot for a configurable solution	Brush	1
45624000 -130 -138		Metal fin	


WITH 1 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA


REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44401000 -130 -138	Customisable in-desk kit with cover, pre-wired with 1 schuko sockets and 3 free slots for configurable solutions	Brush	3
45401000 -130 -138		Metal fin	

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44501000 -130 -138	Customisable in-desk kit with cover, pre-wired with 1 schuko sockets and 4 free slots for configurable solutions	Brush	4
45501000 -130 -138		Metal fin	

REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
44601000 -130 -138	Customisable in-desk kit with cover, pre-wired with 1 schuko sockets and 5 free slots for configurable solutions	Brush	5
45601000 -130 -138		Metal fin	


WITH 2 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44402000	-130 -138	Customisable in-desk kit with cover, pre-wired with 2 schuko sockets and 2 free slots for configurable solutions	Brush
45402000	-130 -138		Metal fin		

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44502000	-130 -138	Customisable in-desk kit with cover, pre-wired with 2 schuko sockets and 3 free slots for configurable solutions	Brush
45502000	-130 -138		Metal fin		

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44602000	-130 -138	Customisable in-desk kit with cover, pre-wired with 2 schuko sockets and 4 free slots for configurable solutions	Brush
45602000	-130 -138		Metal fin		


WITH 3 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44403000	-130 -138	Customisable in-desk kit with cover, pre-wired with 3 schuko sockets and 1 free slot for a configurable solution	Brush
45403000	-130 -138		Metal fin		

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44503000	-130 -138	Customisable in-desk kit with cover, pre-wired with 3 schuko sockets and 2 free slots for configurable solutions	Brush
45503000	-130 -138		Metal fin		



		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44603000	-130 -138	Customisable in-desk kit with cover, pre-wired with 3 schuko sockets and 3 free slots for configurable solutions	Brush
45603000	-130 -138		Metal fin		

WITH 4 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44504000	-130 -138	Customisable in-desk kit with cover, pre-wired with 4 schuko sockets and 1 free slot for a configurable solution	Brush
45504000	-130 -138		Metal fin		

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44604000	-130 -138	Customisable in-desk kit with cover, pre-wired with 4 schuko sockets and 2 free slots for configurable solutions	Brush
45604000	-130 -138		Metal fin		



WITH 5 SCHUKO SOCKETS + FREE SLOT FOR VOICE, DATA AND MULTIMEDIA

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		44605000	Customisable in-desk kit with cover, pre-wired with 5 schuko sockets and 1 free slot for a configurable solution	Brush	1
		45605000		Metal fin	



COMPLETE IN-DESK KITS WITH DUAL-OPENING COVER

WITH SCHUKO SOCKETS



		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
		46404000	Complete in-desk kit with dual-opening cover, pre-wired with 8 schuko sockets	Brush
		47404000		Metal fin

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
		46606000	Complete in-desk kit with dual-opening cover, pre-wired with 12 schuko sockets	Brush
		47606000		Metal fin



WITH USB CHARGER + SCHUKO SOCKETS



		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
		46423000	Complete in-desk kit with dual-opening cover, pre-wired with 4xUSB charger (2.1 A) and 6 schukos	Brush
		47423000		Metal fin

WITH 6 SCHUKO SOCKETS + VOICE AND DATA PLATES FOR RJ45 CONNECTORS

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
		46403020	Complete in-desk kit with dual-opening cover, pre-wired with 6 schuko sockets and plate for 4 RJ45 connectors	Brush
		47403020		Metal fin







WITH 8 SCHUKO SOCKETS + VOICE AND DATA PLATES FOR RJ45 CONNECTORS

		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
		46604040	Complete in-desk kit with dual-opening cover, pre-wired with 8 schuko sockets and plate for 8 RJ45 connectors	Brush
		47604040		Metal fin





		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH
		46602240	Complete in-desk kit with dual-opening cover, pre-wired with 4 schuko sockets, 4 UPS sockets and plate for 8 RJ45 connectors	Brush
		47602240		Metal fin

CUSTOMISABLE IN-DESK KITS WITH DUAL-OPENING COVER





WITH USB CHARGER + SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA

IMAGE		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		46422000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 2 2xUSB chargers (2.1 A), 4 schuko sockets and 2 free slots for configurable solutions	Brush	2x1
		47422000 -130 -138		Metal fin	
		46623000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 4xUSB charger (2.1 A), 6 schukos and 4 free slots for configurable solutions	Brush	2x1
		47623000 -130 -138		Metal fin	
		46624000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 4xUSB charger (2.1A), 8 schukos and 2 free slots for configurable solutions	Brush	2x1
		47624000 -130 -138		Metal fin	


WITH 2 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA


IMAGE		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		46401000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 2 schuko sockets and 6 free slots for configurable solutions	Brush	2x3
		47401000 -130 -138		Metal fin	
		46601000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 2 schuko sockets and 10 free slots for configurable solutions	Brush	2x5
		47601000 -130 -138		Metal fin	

WITH 4 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA


IMAGE		REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
		46402000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 4 sockets and 4 sockets for configurable solution	Brush	2x2
		47402000 -130 -138		Metal fin	
		46602000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 4 schuko sockets and 8 free slots for configurable solutions	Brush	2x4
		47602000 -130 -138		Metal fin	

WITH 6 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA


	REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
	46403000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 6 schuko sockets and 2 free slots for configurable solutions	Brush	2x1
47403000 -130 -138		Metal fin		

	REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
	46603000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 6 schuko sockets and 6 free slots for configurable solutions	Brush	2x3
47603000 -130 -138		Metal fin		

WITH 8 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA






	REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
	46604000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 8 schuko sockets and 4 free slots for configurable solutions	Brush	2x2
47604000 -130 -138		Metal fin		

WITH 10 SCHUKO SOCKETS + FREE SLOTS FOR VOICE, DATA AND MULTIMEDIA




	REFERENCE	DESCRIPTION	CABLE PASS-THROUGH WITH	FREE SLOTS
	46605000 -130 -138	Customisable in-desk kit with dual-opening cover, pre-wired with 10 schuko sockets and 2 free slots for configurable solutions	Brush	2x1
47605000 -130 -138		Metal fin		

COMPLETE INDIVIDUAL CONNECTION SOCKET KITS

WITH 1 SCHUKO SOCKETS

	REFERENCE	DESCRIPTION
	43101000 -130 -138	Panel socket with schuko sockets with 20-cm patch cord with free end termination
	REFERENCE	DESCRIPTION
	43101002 -130 -138	Panel socket with schuko sockets with 20-cm patch cord with quick-connector termination
	REFERENCE	DESCRIPTION
	43101000 -230 -238	Panel socket with patch cord with free end termination
	REFERENCE	DESCRIPTION
	43101002 -230 -238	Panel socket with patch cord with quick-connector termination
	REFERENCE	DESCRIPTION
	43100001 -130 -138	Accessory cover for panel sockets

WITH USB A + C CHARGER

	REFERENCE	DESCRIPTION
	43120000 -130 -138	USB A+C white panel charger with 20-centimetre patch cord with quick connector termination
	REFERENCE	DESCRIPTION
	43120200 -130 -138	White USB A+C panel charger with 20-cm patch cord with free end termination
	REFERENCE	DESCRIPTION
	43100002 -130 -138	Accessory cover for USB A+C charger

Voice, data and multimedia

FINISHES ▶ -030
White -038
Black

VOICE AND DATA PLATES FOR RJ45 CONNECTORS

PLATE FOR 2 RJ45 CONNECTORS WITH DUST COVER



REFERENCE		DESCRIPTION
40000089	-030 -038	Flat plate with dust shutter for 2 RJ45 connectors with Keystone® I and II clip
40013089	-030 -038	Flat plate with dust cover for 2 RJ45 connectors with BeldenCDT® (NORDX) clip, MDVO Giga Flex
40015089	-030 -038	Flat plate with dust shutter for 2 RJ45 connectors with INFRA clip
40016089	-030 -038	Flat plate with dust shutter for 2 RJ45 connectors with ITT Cannon® clip
40019089	-030 -038	Flat plate with dust shutter for 2 RJ45 connectors with PANDUIT clip, MINI-COM Series

PLATE FOR 2 RJ45 CONNECTORS WITHOUT DUST SHUTTER



REFERENCE		DESCRIPTION
40000189	-030 -038	Flat plate without dust shutter for 2 RJ45 connectors with Keystone® I and II clip
40011189	-030 -038	Flat plate without dust shutter for 2 RJ45 connectors with 3M clip, Volition OCK RJ25, K5e, K6
40015189	-030 -038	Flat plate without dust shutter for 2 RJ45 connectors with INFRA clip
40018189	-030 -038	Flat plate without dust shutter for 2 RJ45 connectors with NEXANS clip (LAN mark-5 eVo, LANmark - 6 eVo)
40019189	-030 -038	Flat plate without dust shutter for 2 RJ45 connectors with PANDUIT clip, MINI-COM series

COMPATIBILITY OF VOICE AND DATA PLATES WITH RJ45 CONNECTORS

CONNECTOR PLATES FOR OTHER BRANDS OF CONNECTORS

WITH DUST SHUTTER WINDOW

WITHOUT DUST SHUTTER WINDOW

2 connectors




2 connectors



	WITH DUST SHUTTER WINDOW	WITHOUT DUST SHUTTER WINDOW
SIMON	40000089-03X	40000189-03X
3M®		40011189
Volition OCK®: RJ25, K5e, K6		40011189
BeldenCDT® (NORDX®)	40013089	
MDVO Giga Flex	40013089	
Keystone Giga Flex	40000089	40000189
BRAND-REX® (BICC®)	40000089	40000189
COMMSCOPE® (1375055-2)	40000089	40000189
DATWYLER® (418071)	40000089	40000189
ERSYS®	40000089	40000189
100-011, 100-181, 100-182, 100-215	40000089	40000189
GENERAL CABLE®	40000089	40000189
GIGAMEDIA® (GGM 621030200)	40000089	40000189
INFRA®	40015089	40015189
ITT CANNON®	40016089	
8-406372-2, 1375055-2, 2153001-1	40000089	40000189
Km8 series keystone	40000089	40000189
Tool-less SL110 and SL	40000089	40000189
MOLEX®	40000089	40000189
Clarity TechChoice Keystone	40000089	40000189
PANDUIT®	40019089	40019189
MINI-COM Series	40019089	40019189
Netkey Series	40000089	40000189
ADVANCED Cat6A Series (R509508, R509509)	40000089	40000189
813512	40000089	40000189
RIT®	40000089	40000189
SYSTIMAX® (AVAYA®) (ATT®)	40000089	40000189

RJ45 CONNECTORS

CATEGORY 6A

REFERENCE	DESCRIPTION	CATEGORY	TYPE
 CJ6A45F	Female connector with IDC 110 contacts for pair insertion	6A	FTP

CATEGORY 6

REFERENCE	DESCRIPTION	CATEGORY	TYPE
 CJ645FM	Female connector with IDC 110 contacts for pair insertion	6	FTP
CJ645U	Female connector with IDC 110 contacts for pair insertion	6	UTP

REFERENCE	DESCRIPTION	CATEGORY	TYPE
 CJ645UF	Female-female connector	6	UTP

CATEGORY 5e

REFERENCE	DESCRIPTION	CATEGORY	TYPE
 CJ545FM	Female connector with IDC 110 contacts for pair insertion	5e	FTP
CJ545U	Female connector with IDC 110 contacts for pair insertion	5e	UTP

VOICE AND DATA PATCH CORDS

FTP PATCH CORDS



REFERENCE	DESCRIPTION
CL6A1F	Cat. 6A FTP RJ45-RJ45 patch cord, 1 m
CL6A2F	Cat. 6A FTP RJ45-RJ45 patch cord, 2 m
CL6A3F	Cat. 6A FTP RJ45-RJ45 patch cord, 3 m
CL6A5F	Cat. 6A FTP RJ45-RJ45 patch cord, 5 m
CL61F	Cat. 6 FTP RJ45-RJ45 patch cord, 1 m
CL62F	Cat. 6 FTP RJ45-RJ45 patch cord, 2 m
CL63F	Cat. 6 FTP RJ45-RJ45 patch cord, 3 m
CL65F	Cat. 6 FTP RJ45-RJ45 patch cord, 5 m

UTP PATCH CORDS



REFERENCE	DESCRIPTION
CL61U	Cat. 6 UTP RJ45-RJ45 patch cord, 1 m
CL62U	Cat. 6 UTP RJ45-RJ45 patch cord, 2 m
CL63U	Cat. 6 UTP RJ45-RJ45 patch cord, 3 m
CL64U	Cat. 6 UTP RJ45-RJ45 patch cord, 5 m

MULTIMEDIA PLATES WITH CONNECTORS

MULTIMEDIA PLATES WITH FEMALE-FEMALE CONNECTORS

HDMI




REFERENCE	DESCRIPTION
40001194 -030 -038	HDMI plate with female-female connector patch cord

VGA + minijack



REFERENCE	DESCRIPTION
40000191 -030 -038	Plate with VGA + minijack female-female connector with 22-cm patch cord for VGA and 14-cm for minijack

3 RCA

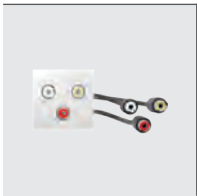

REFERENCE	DESCRIPTION
40001193 -030 -038	Plate with 3 female-female RCA audio connectors with 14-cm patch cords

USB Data



REFERENCE	DESCRIPTION
40001191 -030 -038	Plate with female-to-female USB Type "A" data connector with 22-cm patch cord

Miscellaneous

FINISHES ▶



BLIND PLATES



REFERENCE	DESCRIPTION
40000800 -030 -038	Blind plate

QUICK CONNECTION SYSTEMS FOR ELECTRICAL NETWORKS

CONNECTORS

3-pole



REFERENCE	DESCRIPTION
CR0003 /9 /14 /6	3-pole female aerial quick connector. Screw connection



REFERENCE	DESCRIPTION
CR0004 /9 /14 /6	3-pole male aerial quick connector. Screw connection

5-pole



REFERENCE	DESCRIPTION
CR5003 /14	5-pole female aerial quick connector. Screw connection





REFERENCE	DESCRIPTION
CR5004 /14	5-pole male aerial quick connector. Screw connection


3-POLE QUICK-CONNECT PATCH CORDS





REFERENCE	DESCRIPTION
CR1020 /9 /14	3-pole Schuko female quick-connect patch cord. 2 metres. PVC Cross-section 3x1.5 mm ²


REFERENCE	DESCRIPTION
 CR6020 /9 /14 /6	3-pole female-Schuko quick-connect patch cord. 2 metres. RZ cable - 0.6/1kv. Halogen-free. Cross-section 3x2.5mm ²


REFERENCE	DESCRIPTION
 CR4020 /9 /14 /6	3-pole free end-female quick-connect patch cord. 2 metres. RZ cable - 0.6/1kv. Halogen-free. Cross-section 3x2.5mm ²

REFERENCE	DESCRIPTION
 CR2010 /9 /14 /6	3-pole male-female quick-connect patch cord. 1 metre. RZ cable - 0.6/1kv. Halogen-free. Cross-section 3x2.5 mm ²


REFERENCE	DESCRIPTION
 CR2020 /9 /14 /6	3-pole male-female quick-connect patch cord. 2 metres. RZ cable - 0.6/1kv. Halogen-free. Cross-section 3x2.5mm ²

REFERENCE	DESCRIPTION
 CR2030 /9 /14 /6	3-pole male-female quick-connect patch cord. 3 metres. RZ cable - 0.6/1kv. Halogen-free. Cross-section 3x2.5mm ²

REFERENCE	DESCRIPTION
 CR2040 /9 /14 /6	3-pole male-female quick-connect patch cord. 4 metres. RZ cable - 0.6/1kv. Halogen-free. Cross-section 3x2.5mm ²

REFERENCE	DESCRIPTION
 CR2050 /9 /14 /6	3-pole male-female quick-connect patch cord. 5 metres. RZ cable - 0.6/1kv. Halogen-free. Cross-section 3x2.5mm ²

JUNCTIONS

REFERENCE	DESCRIPTION
 CR7312 /14	3-pole T-junction with 1 male inlet and 2 female outlets

HINGED CABLE ORGANISER

KITS

4-workstation kit



REFERENCE	DESCRIPTION
49204004 -030 -038	Kit consisting of hinged cable organiser for 4 workstations

CABLE OUTLET

Cable outlet for raised access floor or furniture (Ø102 mm)



REFERENCE	DESCRIPTION
52055000 -030 -038	Allows wiring to pass from the raised access floor to the surface. Closed, it prevents the ingress of dust or other elements

Distribution boxes

DISTRIBUTION BOXES

REGULAR 3-POLE CIRCUIT

1 input 4 outputs



REFERENCE	DESCRIPTION
49114000-039	Distribution box regular circuit with 1 3-pole input with Wieland® GST18i figure and 4 3-pole outputs with Wieland® GST18i figure

1 input 5 outputs



REFERENCE	DESCRIPTION
49115000-039	Distribution box regular circuit with 1 3-pole input with Wieland® GST18i figure and 5 3-pole outputs with Wieland® GST18i figure

1 input 6 outputs



REFERENCE	DESCRIPTION
49116000-039	Distribution box regular circuit with 1 3-pole input with Wieland® GST18i figure and 6 3-pole outputs with Wieland® GST18i figure

1 input 7 outputs



REFERENCE	DESCRIPTION
49117000-039	Distribution box regular circuit with 1 3-pole input with Wieland® GST18i figure and 7 3-pole outputs with Wieland® GST18i figure

1 input 8 outputs



REFERENCE	DESCRIPTION
49118000-039	Distribution box regular circuit with 1 3-pole input with Wieland® GST18i figure and 8 3-pole outputs with Wieland® GST18i figure

1 input 9 outputs



REFERENCE	DESCRIPTION
49119000-039	Distribution box regular circuit with 1 3-pole input Wieland GST18i and 9 Wieland GST18i 3-pole outputs

3-POLE UPS CIRCUIT

1 input 5 outputs



REFERENCE	DESCRIPTION
49120500-039	Distribution box UPS circuit with 1 3-pole input with Wieland® GST18i figure and 5 3-pole outputs with Wieland® GST18i figure

1 input 7 outputs



REFERENCE	DESCRIPTION
49120700-039	Distribution box UPS circuit with 1 3-pole input with Wieland® GST18i figure and 7 3-pole outputs with Wieland® GST18i figure

REGULAR CIRCUIT + UPS

2 inputs; 3 regular outputs + 3 UPS



REFERENCE	DESCRIPTION
49133300-039	Distribution box for UPS circuit with 2 3-pole inputs with Wieland® GST18i figure, one for regular circuit and the other for UPS circuit and 3 3-pole outputs with Wieland® GST18i figure for each circuit

2 inputs; 4 regular outputs + 4 UPS



REFERENCE	DESCRIPTION
49134400-039	Distribution box for UPS circuit with 2 3-pole inputs with Wieland® GST18i figure, one for regular circuit and the other for UPS circuit and 4 3-pole outputs with Wieland® GST18i figure for each circuit

REGULAR 5-POLE CIRCUIT

1 5-pole input; 1 5-pole output + 3 3-pole outputs



REFERENCE	DESCRIPTION
49143010-039	Distribution box regular circuit with 1 5-pole input and 3 3-pole outputs with Wieland® GST18i figure and 1 5-pole output with Wieland® GST18i figure



1 5-pole input; 1 5-pole output + 6 3-pole outputs





REFERENCE	DESCRIPTION
49146010-039	Distribution box regular circuit with 1 5-pole input and 6 3-pole outputs with Wieland® GST18i figure and 1 5-pole output with Wieland® GST18i figure









TECHNICAL INFORMATION

ON-DESK KITS

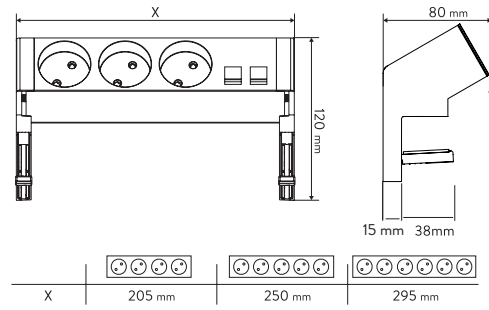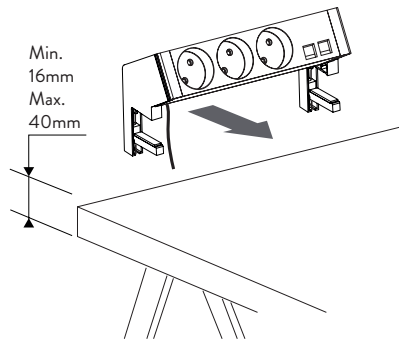

IN-DESK KITS

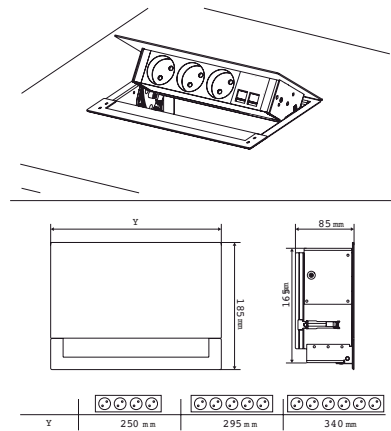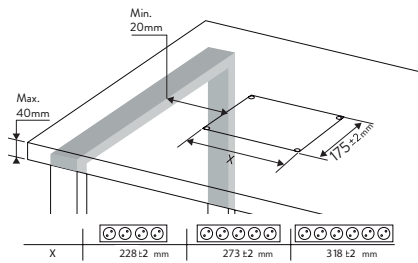

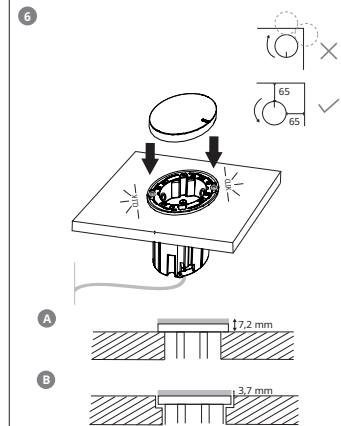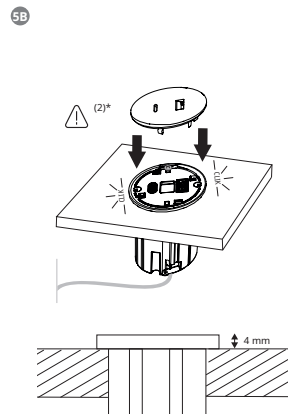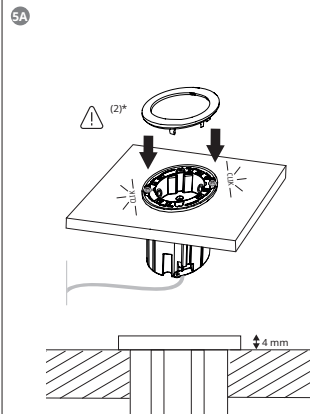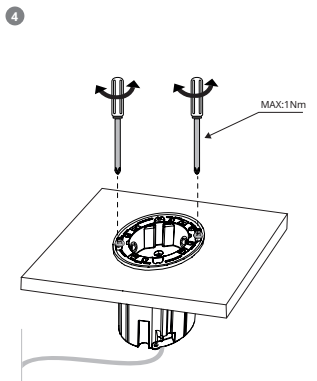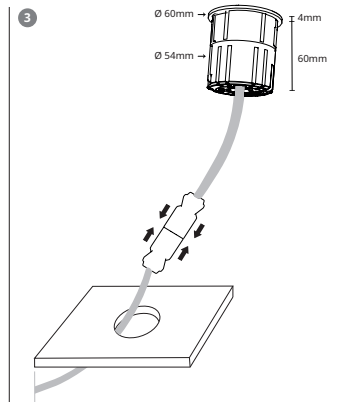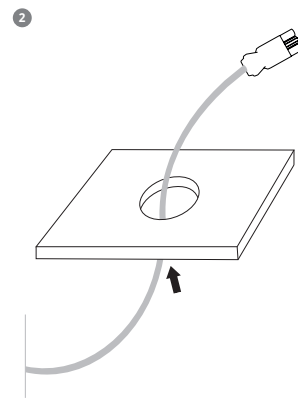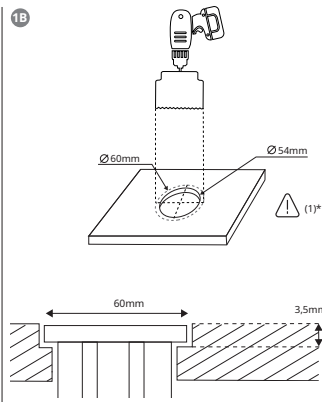
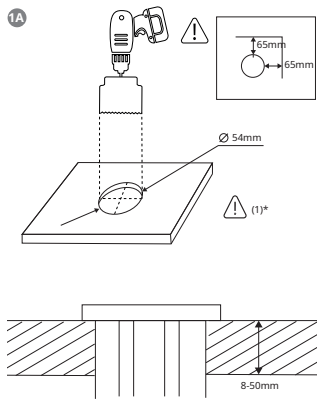


VOICE, DATA AND MULTIMEDIA

REFERENCE

4000089



4000189

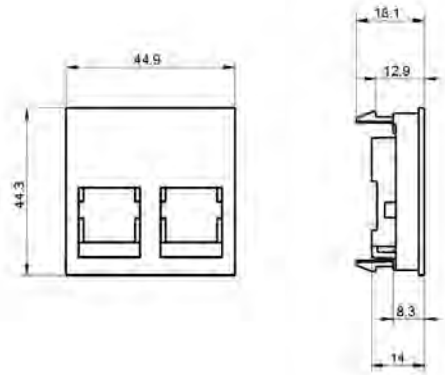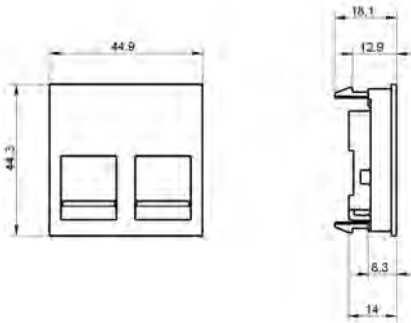

REFERENCE

4000191



40001194

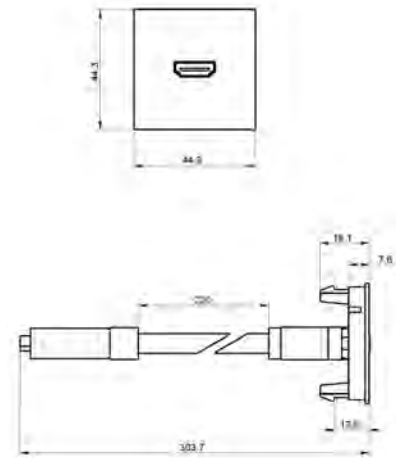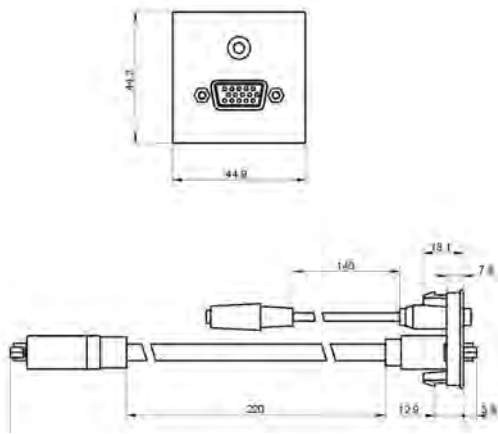

REFERENCE

40001193



40001191

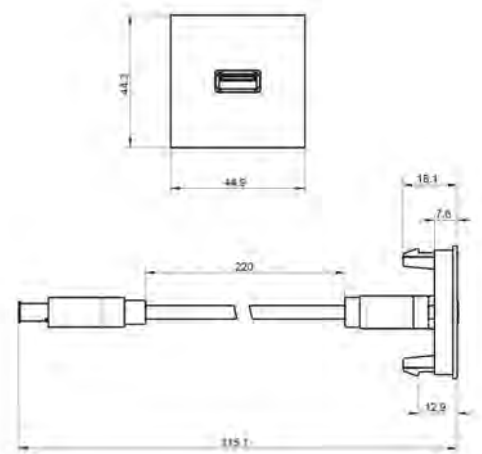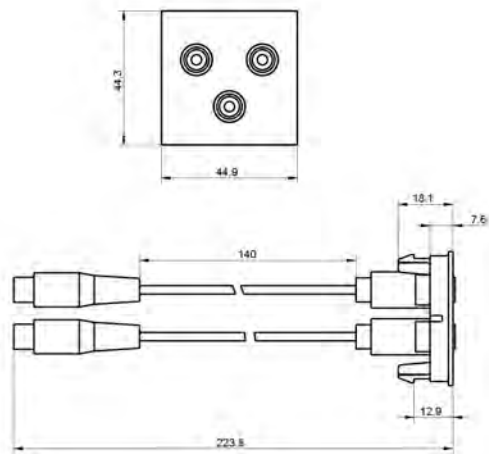

MISCELLANEOUS

REFERENCE

40000800

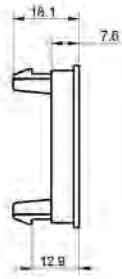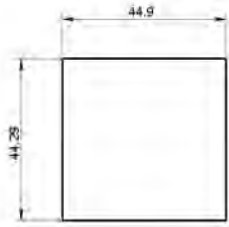



www.simonelectric.com



SIMON S.A.U.

Sancho de Ávila, 66
08018 Barcelona

Customer service

Tel. (+34) 651 761 314 / (+34) 651 761 328
customerservice@simon.es

Visit us at:

La Casa de la Luz
Santa Cruz de Marcenado, 1
28015 Madrid

**Technical
Customer Service**

Tel. (+34) 651 761 346
sat@simon.es

Customer Service

Tel. 651 761 314

By appointment:
lacasadelaluz@simonelectric.com