

SARI®

LUMINOUS PAINT



COLORTEK®

450/00 - Arjun Base White

EN

SARI®

Sari® is a water-based decorative paint easily applied without requiring long and difficult wall preparation, allowing applicators to effortlessly achieve highly aesthetic finishes.

Technical Name
Luminous paint.

Key Properties

- Unleaded
- Water Based
- Washable (after full curing)
- Non-flammable
- Odorless
- 1 attractive base color (450)
- Very low VOC content in compliance with:
 - EU directive 2010/79/EU
 - French decree No: 2011-321

Pack Size

- 1 US Quart - (1 kg)
- 1 US Gallon - (3 kg)

Recommended Uses
Internal applications

Type of Substrate

Plaster, embossed wall coverings, gypsum board, concrete, cement rendering, brick work & block work.

Finish

Soft textured metallic.

Coverage

Approximately 10 m²/kg/coat - 2 coats required.

Drying Time

15 minutes to 1 hour depending on temperature and humidity.

 
Thinner

No thinning required.

Preparation

All surfaces to be painted should be clean, dry and free from loose & flaking material. Rub down & rinse. Prime the substrate with the appropriate Colortek® Co.Acryl or C1 Family.

CODING SYSTEM



Instructions

Sari's soft texture and sense of depth is achieved in two coats. Apply the first coat using a roller and when totally dry apply the second coat by stippling the surface with a marine sponge the by blading down the product using an Inox trowel to create the final pattern.

Do not apply at temperatures below 5°C or when rain is expected.

Recommendation

Achieving the correct lighting is critical to the success of Sari® walls. To get the best results it is important to light the surface to achieve the optimum pigment sparkle.

Cleaning

Remove as much product as possible from application equipment before cleaning.

Clean equipment immediately after use with warm soapy water & rinse thoroughly.

Do not empty product into drains or watercourses.

Additional Info

Product batches are tested using a quality control system and are ISO: 9001:2008 certified.

Transportation & Storage

Care should be taken to avoid spillage. Protect from frost & humidity.

FR

SARI®

Sari® est une peinture décorative offrant une finition texturée douce aux reflets métalliques, sans nécessiter des travaux de préparation laborieux.

Nom Technique

Jeu de lumière.

Propriétés

- Ne contient pas de plomb
- Produit en base eau
- Lavable
- Inodore
- 1 base (450)
- Faible teneur en COV conformément aux:
 - Directive EU directive 2010/79/EU
 - Decret Français No: 2011-321

Emballage

- 1 US Quart - (1 kg)
- 1 US Gallon - (3 kg)

SYSTEME DE CODAGE



Usage Recommandé
Application en intérieur.

Types de Support

Enduit, ciment, plâtre et plaque de plâtre, anciennes peintures usuelles absorbantes, etc.

Finition

Finition métallique texturée.

Rendement

Environ 10m² / kg / couche - 2 couches requises.

Temps de séchage

Environ 15 à 60 minutes en fonction des conditions climatiques et de la température ambiante.

Diluant

Aucune dilution requise.

Préparation du Support

Le support doit être dur, propre, sain, sec, cohésif et libre de toute matière telle que salpêtre, mousse, lichen ou autres microorganismes pouvant empêcher l'adhérence du produit sur le support. Dans un premier temps, appliquer la couleur appropriée de la sous-couche Colortek® Co.Acryl ou famille C1.

Application

La texture de Sari® s'obtient en deux étapes. Appliquez la première couche avec un rouleau. Une fois la première couche ayant séchée, appliquez la deuxième couche afin d'obtenir un effet tacheté en utilisant une éponge marine comme un tampon avant de passer une truelle Inox sur la surface. Ne pas appliquer à une température ambiante inférieure à 5°C ou par temps pluvieux.

Recommandation

Il est recommandé d'installer un système d'illumination approprié afin de mettre en valeur l'effet nacré de Sari®.

Nettoyage des Outils

Eliminer autant que possible le reste du produit de la surface des outils. Nettoyer ces derniers en les frottant vigoureusement avec de l'eau et du savon. Ne pas vider les restes du produit dans égouts ou les voies d'eau.

Information Additionnelle

Le processus de fabrication de Sari® est soumis au plus stricts contrôles de qualité certifiés conformes au standard ISO 9001 : 2008

Transport et Stockage

Stocker le produit à l'abri de l'humidité et des températures de gel.



COLORTEK®
TECHNOLOGY IN ALL ITS COLORS



www.colortek.eu
info@colortek.eu





450/73 - Sugar Base White



450/79 - Spirit Base IT 124-7



450/85 - Lava Base IT 52-7



450/91 - Memory Base IT 46-7



450/97 - Pyramid Base IT 123-6



450/103 - Dawn Base IT 10-1



450/109 - Sundance Base IT 124-6



450/115 - Geometric Base IT 124-2



450/00 - Arjun Base White



 
450/126 - Speedboat Base IT 113-5



450/132 - Clarity Base IT 29-1




450/138 - Vivid Base IT 137-2



450/74 - Sandy Base White



 450/80 - Haze Base IT 89-1



450/86 - Picante Base IT 52-7



450/92 - Blush Base IT 122-7



450/98 - Bark Base IT 123-6



450/104 - Coffee Base IT 122-7



450/110 - Dunes Base IT 124-6



450/116 - Drama Base IT 148-6



450/121 - Spotlight Base IT 118-5



 
450/127 - Waves Base IT 73-3



450/133 - Charm Base IT 29-1



450/139 - Garden Base IT 137-2



450/75 - Desert Base White



450/81 - Sublime Base IT 52-7



450/87 - Volcano Base IT 89-7



450/93 - Camelia Base IT 49-6




450/99 - Organza Base IT 123-6



450/105 - Smokey Base IT 123-6



450/111 - Temple Base IT 123-6

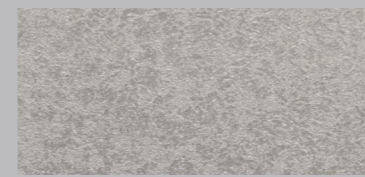

450/117 - Moon Base IT 148-6



450/122 - Plum Base IT 118-5



 
450/128 - Helium Base IT 72-5



450/134 - Fresh Base IT 29-2



450/140 - Spring Base IT 140-2



450/76 - Paper Base White



450/82 - Rare Base IT 52-7



 
450/88 - Mysteries Base IT 7-3



450/94 - Lipstick Base IT 49-6




450/100 - Platinum Base IT 123-6




450/106 - Taupe Base IT 118-2



 450/112 - Arrows Base IT 118-2



450/118 - Mortar Base IT 145-3

 


450/123 - Paparazzi Base IT 78-4



450/129 - Dive Base IT 73-4



450/135 - Lime Base IT 29-2

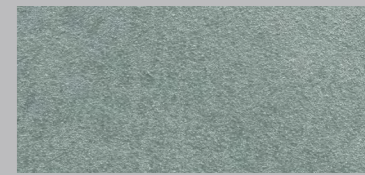

450/141 - Vision Base IT 142-3



450/77 - Footprint Base IT 1-2



450/83 - Dust Base IT 52-7



450/89 - Dusk Base IT 10-1



450/95 - Rose Base IT 46-7



 
450/101 - Showtime Base IT 123-6




450/107 - Romance Base IT 122-6



450/113 - Caffeine Base IT 118-2




450/119 - Urban Base IT 148-6

 


450/124 - Aura Base IT 78-4



 450/130 - Jetski Base IT 113-5



450/136 - Tree Base IT 29-4

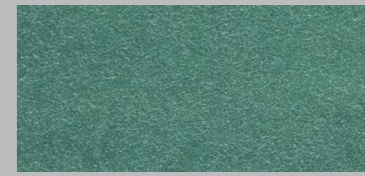

450/142 - Willow Base IT 69-4



 
450/78 - Golden Base 237



450/84 - Creamery Base IT 52-7



450/90 - Tropical Base IT 89-7




450/96 - Milan Base IT 46-7




450/102 - Clay Base IT 123-6




450/108 - Truffle Base IT 122-6

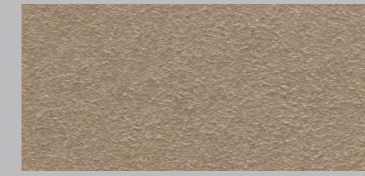

450/114 - District Base IT 118-2

 


450/120 - Inox Base IT 145-3

 


450/125 - Opera Base IT 145-3



 450/131 - Absolute Base IT 145-3



450/137 - Grass Base IT 29-4

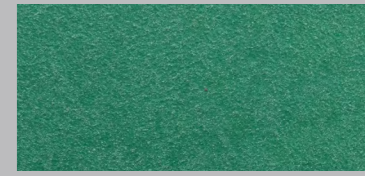

450/143 - Fluo Base IT 66-4