



COLORTEK®

TECHNOLOGY IN ALL ITS COLORS



[www.colortek.eu](http://www.colortek.eu)  
[info@colortek.eu](mailto:info@colortek.eu)

  [colortekpaints](https://www.instagram.com/colortekpaints)

**HAMMER**

HAMMERED  
METALLIC FINISH



COLORTEK®




BT/112 - Smoke




BT/124 - Greige



BT/100 - Travertino

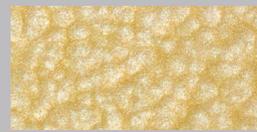

BT/110 - Vanilla

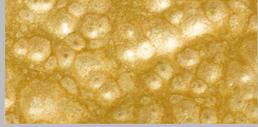

BT/108 - Gold Fever




BT/202 - Goldfish



BS/184 - Aged Gold




BT/204 - Steel

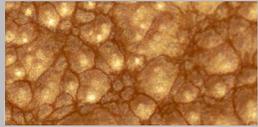


BT/132 - Sweet & Sour



BT/144 - Pepper

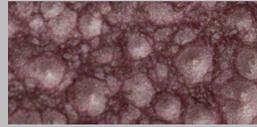

BT/129 - Plum

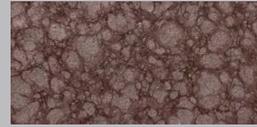


BS/179 - Rojo




BS/155 - Caramel



BT/106 - Ancient

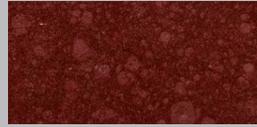

BS/180 - Red Wine

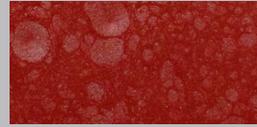


BT/203 - Rouge




BS/150 - Silver



BS/138 - Dove Grey

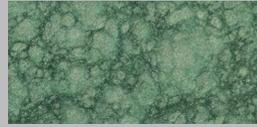

BS/157 - Bosco

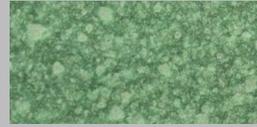

BS/163 - Verde



BT/131 - Aqua



BT/205 - Turquoise



BS/169 - Oceano



BS/192 - Azul



BT/149 - Lead



BT/198 - Granite



BS/177 - Tempesta



BT/102 - Black Graphite

EN **HAMMER**®

Hammer Paint is an alkyd based metallic paint that portrays a special hammer tone effect suitable for multi-surface work where a durable, rust preventive coating is required. Commonly used to spray elevator doors and machinery.

**Technical Name**

Hammered Paint.

**Key Properties**

- Protective & decorative finish
- Ideal for rust prevention
- Quick drying finish

**Recommended Uses**

Interior applications.

**Type of Substrate**

Metal, plaster, embossed wall coverings, gypsum board, and other properly primed substrates.

**Finish**

Hammered metallic finish.

**Coverage**

7-8 m<sup>2</sup>/kg/coat – 2 coats required.

**Drying Time**

- Touch-dry in 5-10 minutes.

**Thinner**


No thinning is required.

**Application by Roll**

Applied by brush, roller or airless spray

**Pack Size**

- 1 US Quart – 0.875kg
- 1 US Gallon – 3.5kg

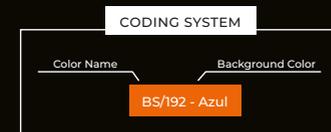

Certificate LB18/234269