

Urchin Flush Mount 20"

SKU: 10401F-20




Finish Options

 Brass



duttonbrown.com/finishes

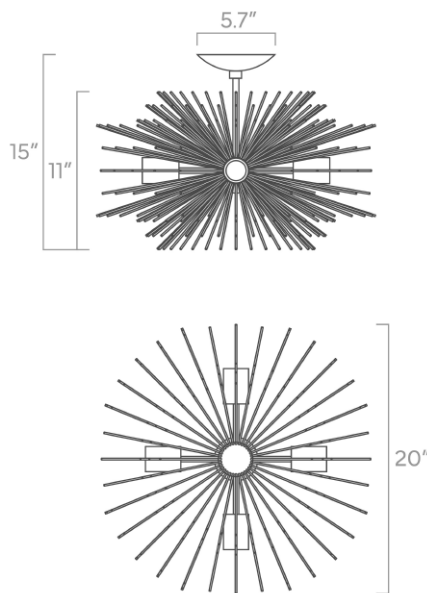

Dimensions

20" x 20" x 11"

Weight

10 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Urchin Flush Mount 27"

SKU: 10401F-27





Finish Options

 Brass



duttonbrown.com/finishes

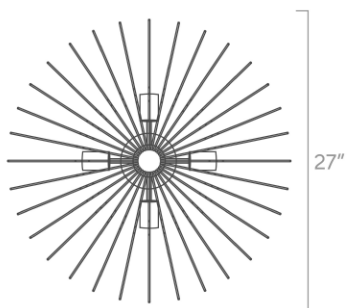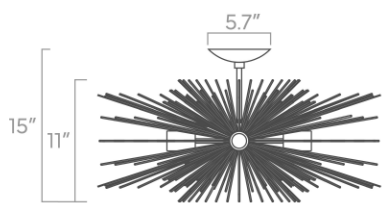

Dimensions

27" x 27" x 11"

Weight

11 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Beaded Urchin Flush Mount 20"

SKU: 10403F-20





Finish Options

● Brass

Color Options

○ White	● Ochre
● Bone	● Orange
● Spa	● Riding Hood Red
● Python Green	● Barely
● Lagoon	● Chalk
● Cobalt	● Black
● Slate Blue	● Black

duttonbrown.com/finishes

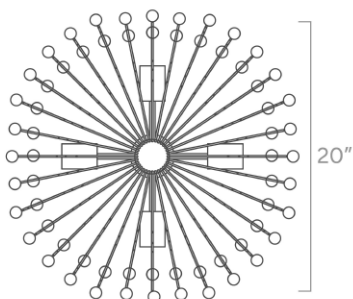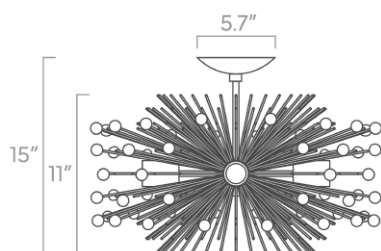

Dimensions

20" x 20" x 11"

Weight

12 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Beaded Urchin Flush Mount 27"

SKU: 10403F-27






Finish Options

 Brass

Color Options

 White	 Ochre
 Bone	 Orange
 Spa	 Riding Hood Red
 Python Green	 Barely
 Lagoon	 Chalk
 Cobalt	 Black
 Slate Blue	 Black

duttonbrown.com/finishes

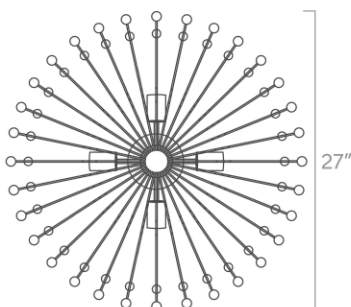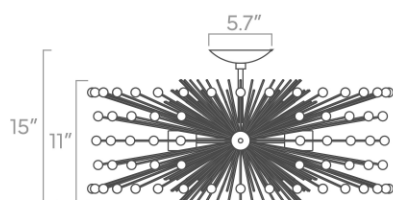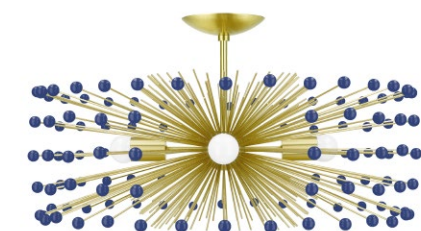

Dimensions

27" x 27" x 11"

Weight

14 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Sputnik Flush Mount

SKU: 20630





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

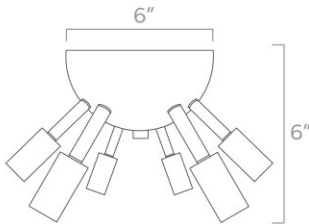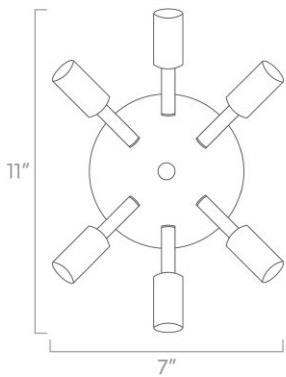

Dimensions

11" x 7" x 6"

Weight

2 lb

Installed Height

6"

Rating

- (6) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)

Certifications

- UL listed for dry locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Elliptical Sputnik Flush Mount

SKU: 21800F




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

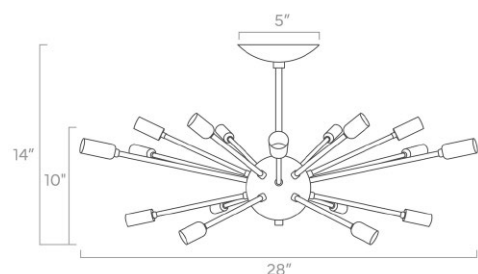

Dimensions

28" x 28" x 10"

Weight

5 lb

Installed Height

14"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Rating

- (18) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 6"

SKU: 30112F-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

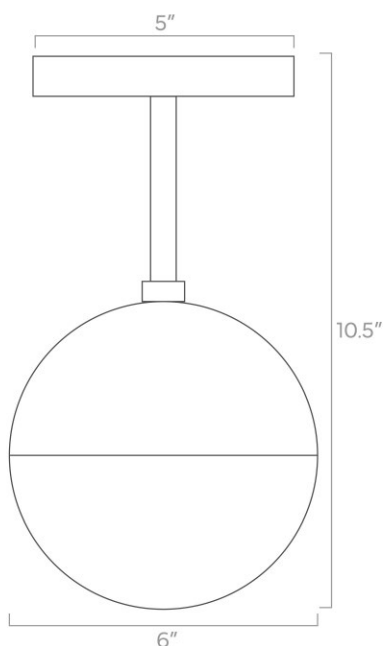

Dimensions

10.5" x Ø6"

Weight

2 lb

Installed Height

10.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 8"

SKU: 30112F-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

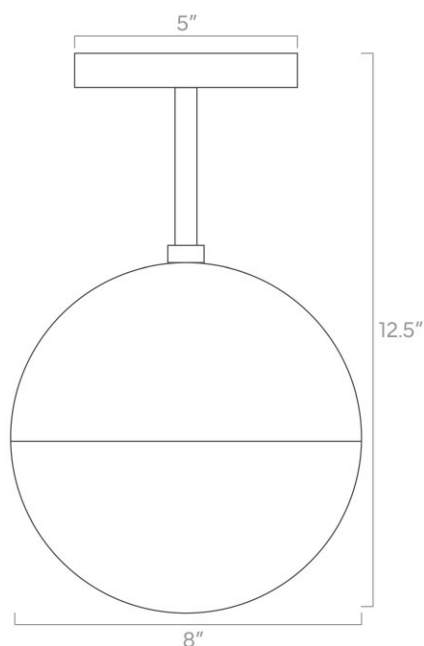

Dimensions

12.5" x Ø8"

Weight

3 lb

Installed Height

12.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 10"

SKU: 30112F-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

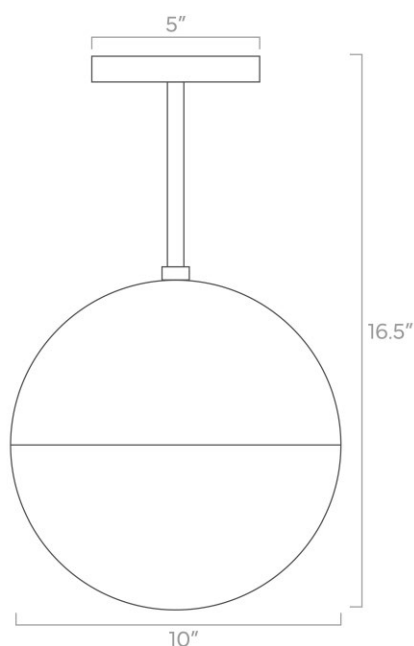

Dimensions

16.5" x Ø10"

Weight

4 lb

Installed Height

16.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 12"

SKU: 30112F-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

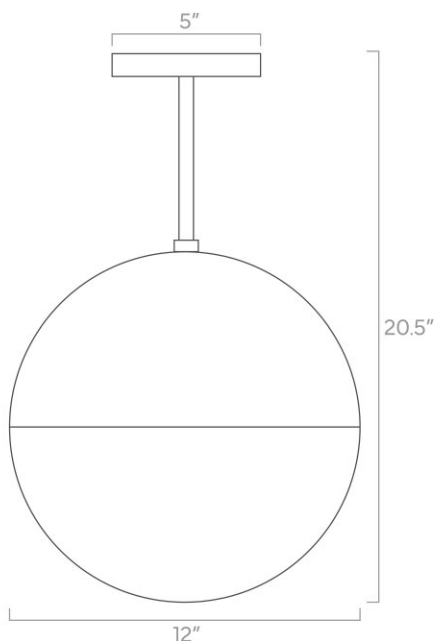

Dimensions

20.5" x Ø12"

Weight

5 lb

Installed Height

20.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 6"

SKU: 30130-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

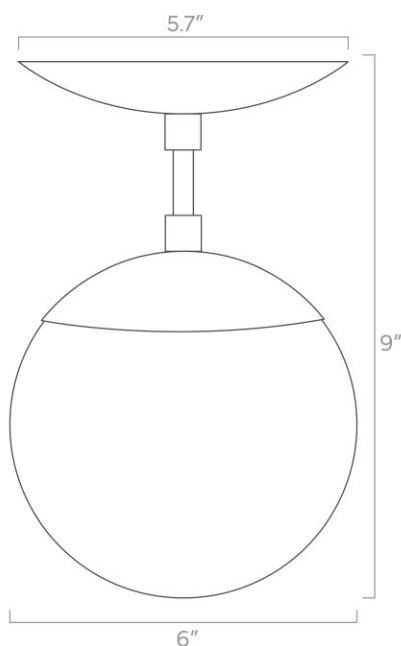

Dimensions

9" x Ø6"

Weight

1 lb

Installed Height

9"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 8"

SKU: 30130-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

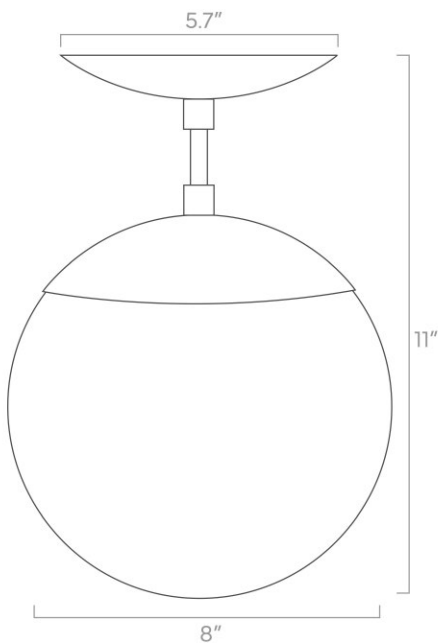

Dimensions

11" x Ø8"

Weight

2 lb

Installed Height

11"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 10"

SKU: 30130-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

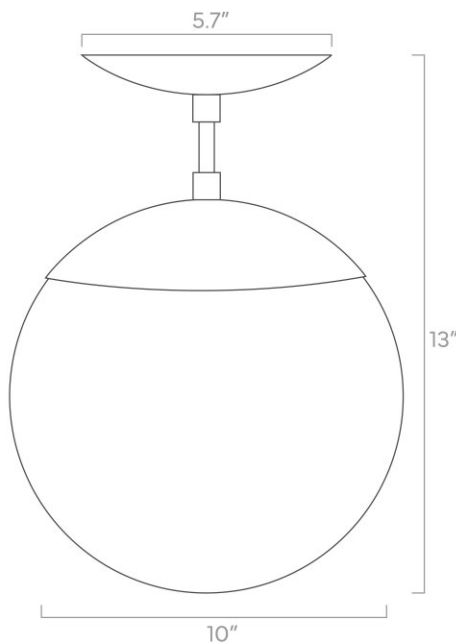

Dimensions

13" x Ø10"

Weight

3 lb

Installed Height

13"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 12"

SKU: 30130-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

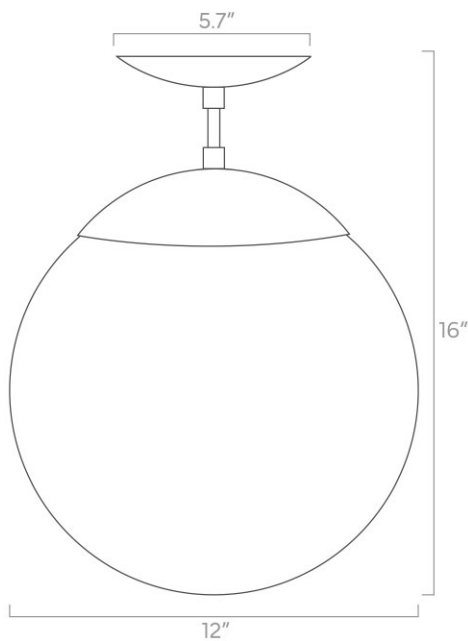

Dimensions

16" x Ø12"

Weight

4 lb

Installed Height

16"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Icon 2 Flush Mount

SKU: 30230




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

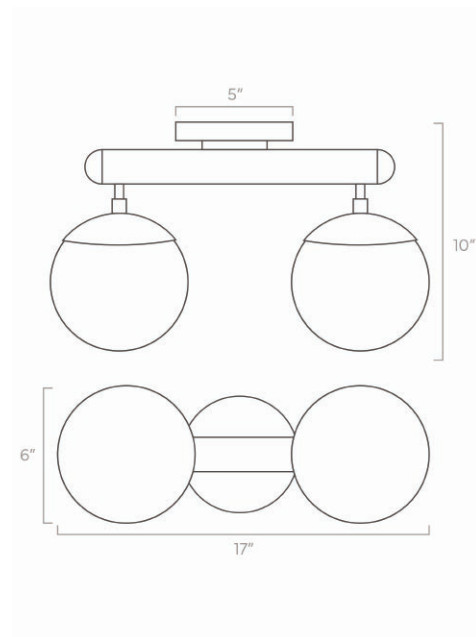

Dimensions

17" x 10" x 6"

Weight

4 lb

Installed Height

10"

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Ballsy Flush Mount

SKU: 30330





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

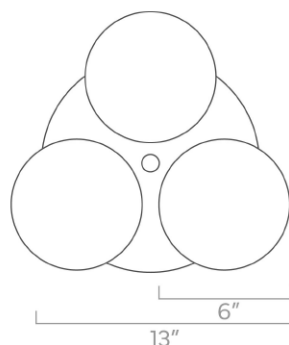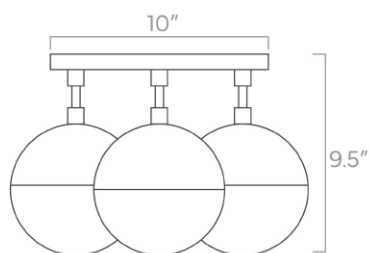

Dimensions

13" x 13" x 9.5", Globe: 6"

Weight

6 lb

Installed Height

9.5"

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Supreme Flush Mount

SKU: 30332




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

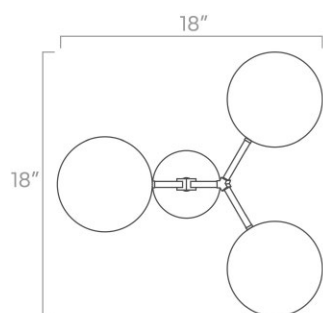

Dimensions


18" x 18" x 11"

Weight

4 lb

Installed Height

11"

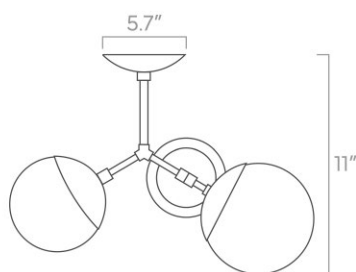

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Icon 3 Flush Mount

SKU: 30333




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

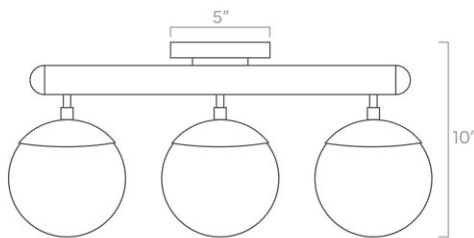

Dimensions

23" x 10" x 6"

Weight

5 lb

Installed Height

10"

Configuration


- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Aluminum
- Brass
- Opal glass

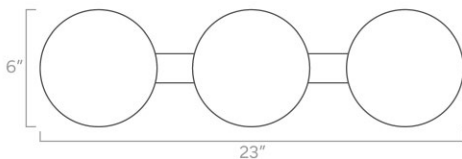

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Orbi Flush Mount

SKU: 30402F





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

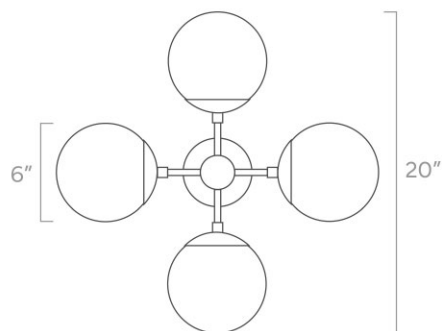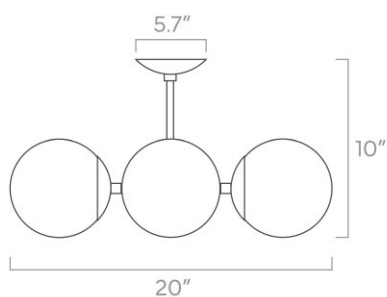

Dimensions

20" x 20" x 6"

Weight

7 lb

Installed Height

10"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Big Orbi Flush Mount

SKU: 30403F





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

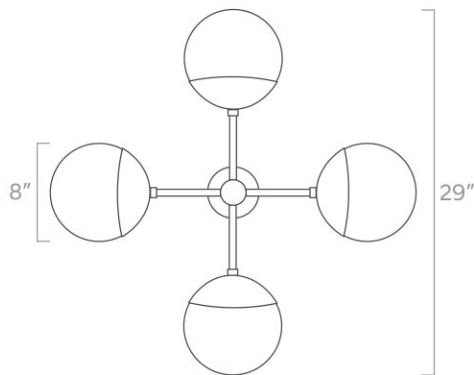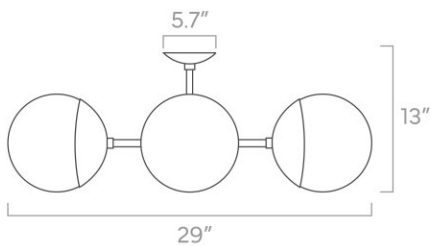

Dimensions

29" x 29" x 8"

Weight

10 lb

Installed Height

13"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Opal glass

Engage



duttonbrown.com/engage

Tetra Flush Mount

SKU: 30404F





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

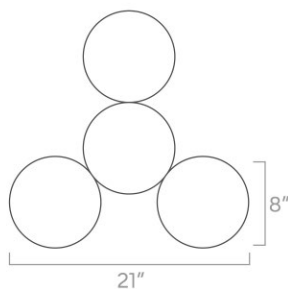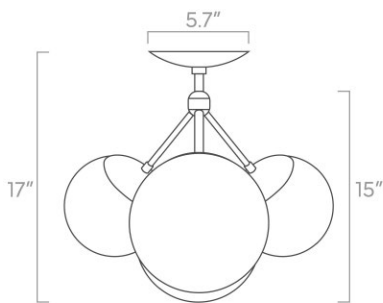

Dimensions

21" x 21" x 15"

Weight

9 lb

Installed Height

17"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Brass
- Opal glass

Engage



duttonbrown.com/engage

Status Flush Mount

SKU: 30405F




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

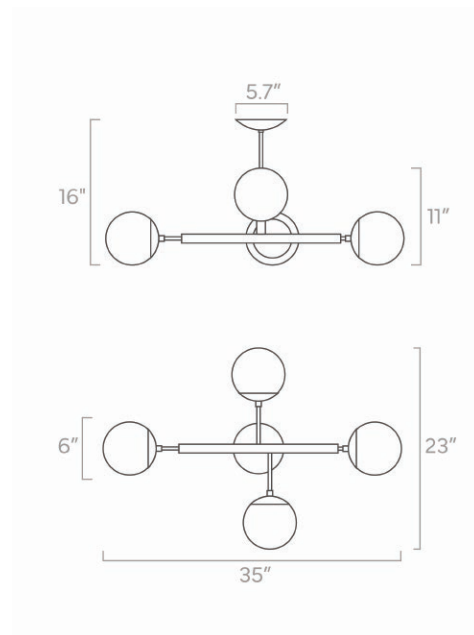

Dimensions

35" x 23" x 11"

Weight

7 lb

Installed Height

16"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Glass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Big Status Flush Mount

SKU: 30407F




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

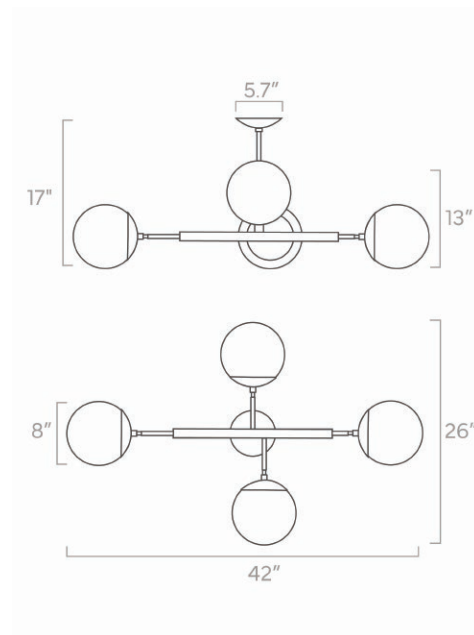

Dimensions

42" x 26" x 13"

Weight

12 lb

Installed Height

17"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Crown Flush Mount 32"

SKU: 31000F




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

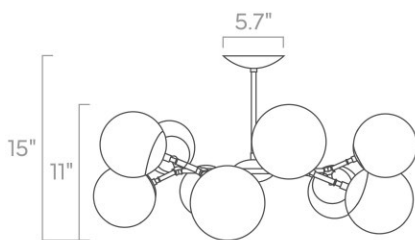

Dimensions

32" x 32" x 11"

Weight


16 lb

Installed Height

15"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

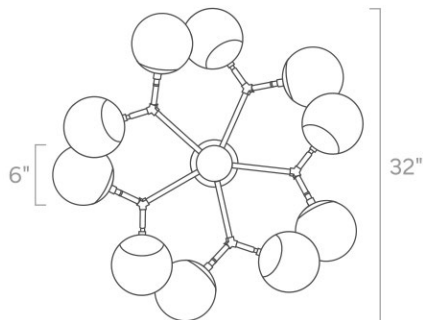

Rating

- (10) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Crown Flush Mount 46"

SKU: 31000F





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

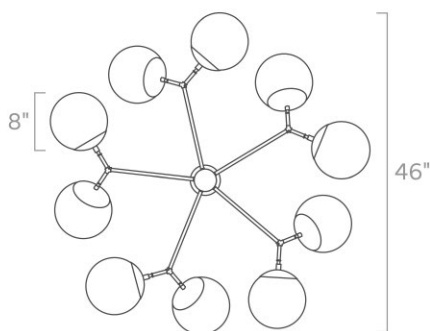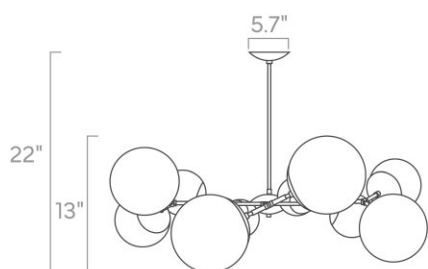

Dimensions

46" x 46" x 13"

Weight

20 lb

Installed Height

22"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Brass
- Opal glass

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Maxo Flush Mount 8"

SKU: 40131-8

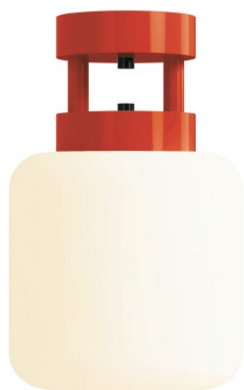


Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

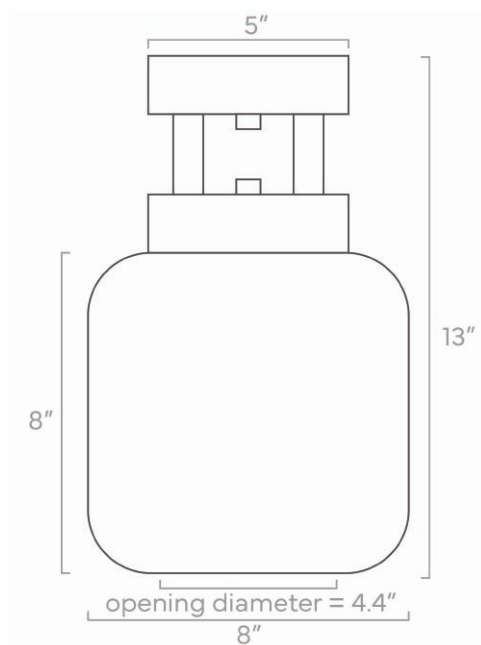

Dimensions

13" x Ø8"

Weight

3 lb

Installed Height

13"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Maxo Flush Mount 13"

SKU: 40131-13




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

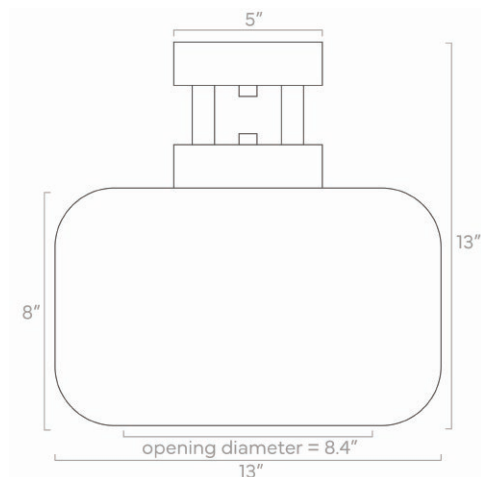

Dimensions

13" x Ø13"

Weight

4 lb

Installed Height

13"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cadbury Flush Mount 8"

SKU: 50130-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

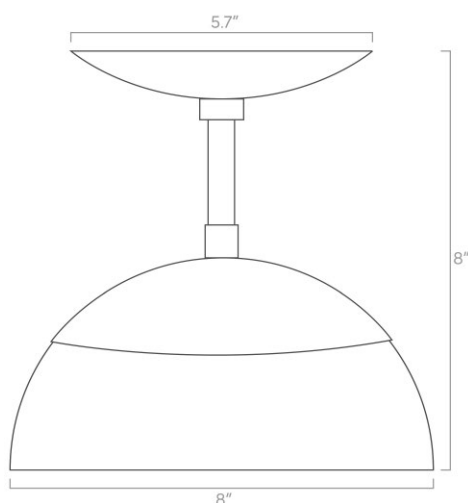

Dimensions

8" x Ø8"

Weight

2 lb

Installed Height

8"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Cadbury Flush Mount 10"

SKU: 50130-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

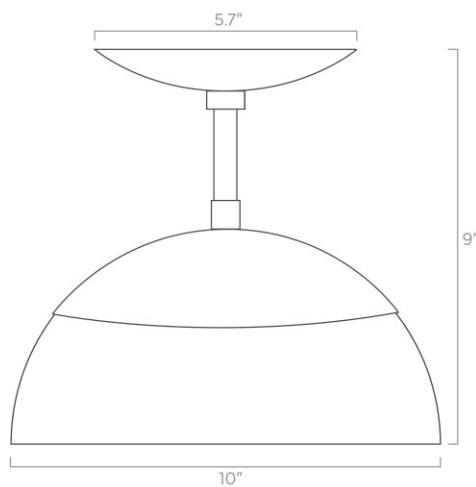

Dimensions

9" x Ø10"

Weight

3 lb

Installed Height

9"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Cadbury Flush Mount 12"

SKU: 50130-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

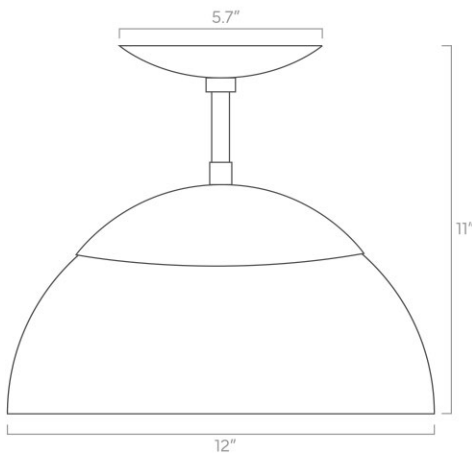

Dimensions

11" x Ø12"

Weight

4 lb

Installed Height

11"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Hemi Flush Mount 8"

SKU: 50131-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

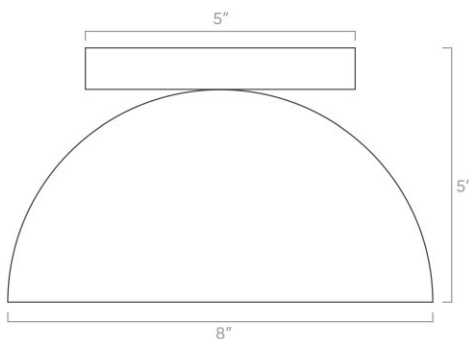

Dimensions

5" x Ø8"

Weight

2 lb

Installed Height

5"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Flush Mount 10"

SKU: 50131-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

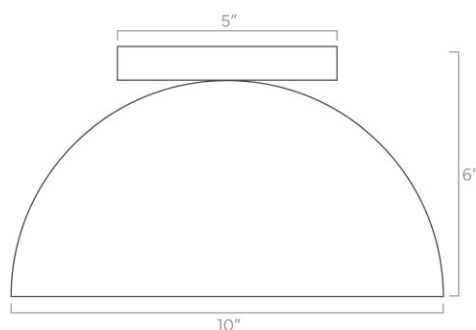

Dimensions

6" x Ø10"

Weight

3 lb

Installed Height

6"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Flush Mount 12"

SKU: 50131-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

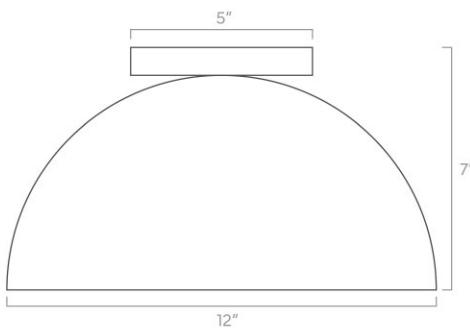

Dimensions

7" x Ø12"

Weight

4 lb

Installed Height

7"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Alegria Flush Mount

SKU: 51000F





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

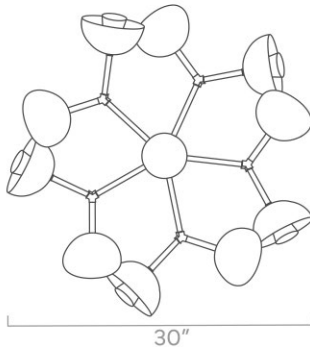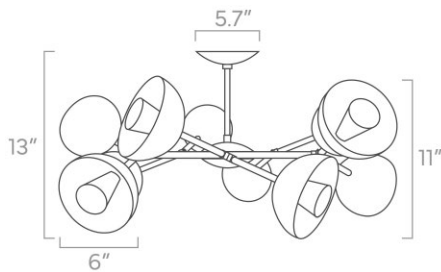

Dimensions

30" x 30" x 11"

Weight

12 lb

Installed Height

13"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass


Engage



duttonbrown.com/engage

Reader Flush Mount

SKU: 60130

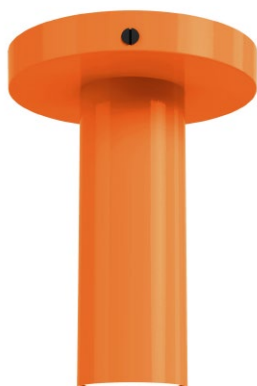


Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

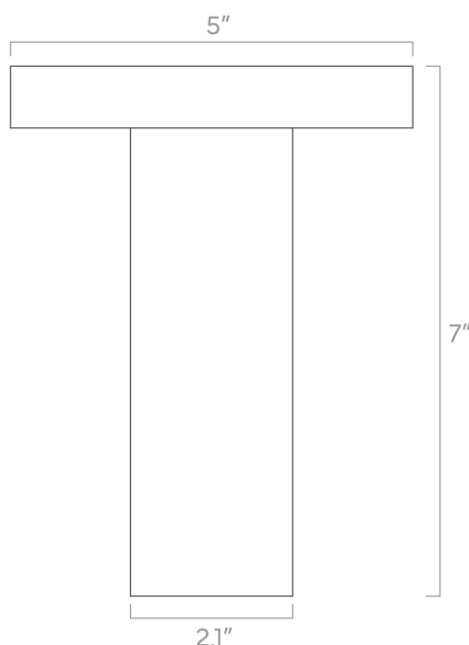

Dimensions

7" x Ø5"

Weight

1 lb

Installed Height

7"

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant and sconce

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Eureka Flush Mount

SKU: 60131




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

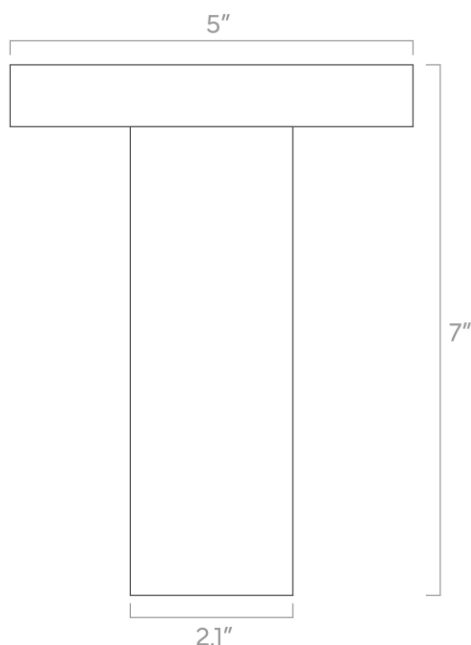

Dimensions

7" x Ø5"

Weight

1 lb

Installed Height

7"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Twink Flush Mount

SKU: 60132




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

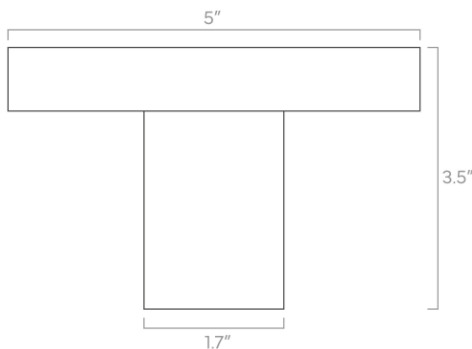

Dimensions

3.5" x Ø5"

Weight

1 lb

Installed Height

3.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling
- Available as pendant

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Pilot Flush Mount 29"

SKU: 60230




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

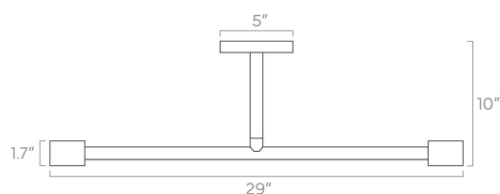

Dimensions

29" x 1.7" x 1.7"

Weight

2 lb

Installed Height

10"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant and sconce

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Pilot Flush Mount 47"

SKU: 60231




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

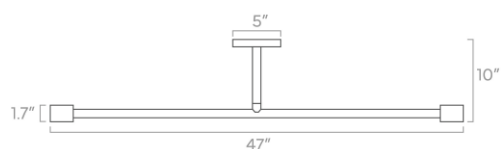

Dimensions

47" x 1.7" x 1.7"

Weight

3 lb

Installed Height

10"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant and sconce

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Pose Flush Mount

SKU: 60330





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

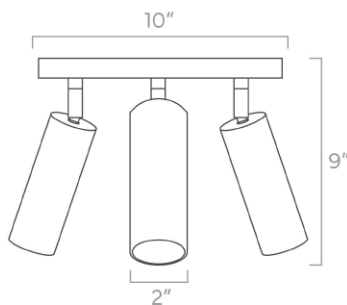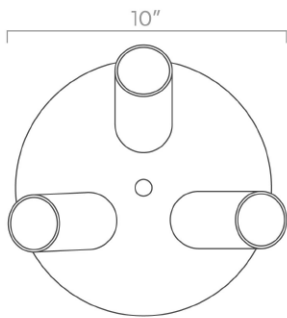

Dimensions

10" x 10" x 9", Lamp Cup: 6" x 2"

Weight

5 lb

Installed Height

9"

Rating

- (3) Medium base E26 sockets
 - 120V, MAX 7W per socket
 - (3) LED PAR16 bulbs included.
- 4.5W, 450 lm, 3000K.

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Contains 3 repositionable arms which swivel up to 90° and rotate up to 330° stopping in center.

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Captain Flush Mount 29"



SKU: 60430



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

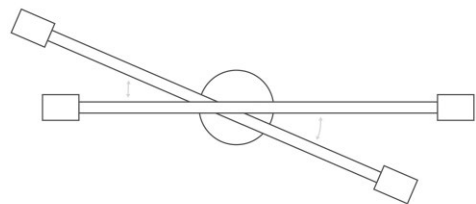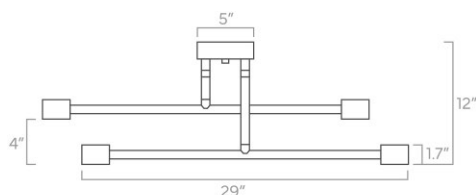

Dimensions

29" x 1.7" x 1.7" (2 rotatable tiers)

Weight

6 lb

Installed Height

12"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Captain Flush Mount 47"



SKU: 60431



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

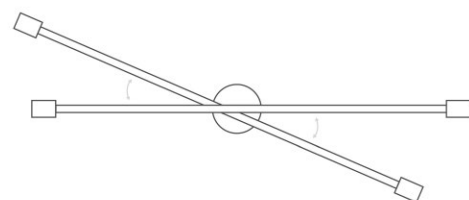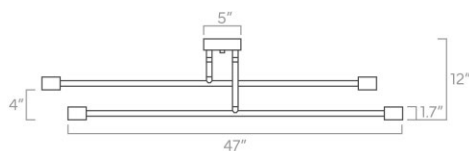

Dimensions

47" x 1.7" x 1.7" (2 rotatable tiers)

Weight

7 lb

Installed Height

12"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Vogue 4 Flush Mount


SKU: 60432



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

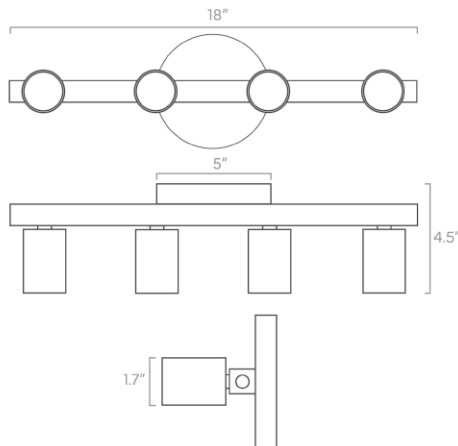

Dimensions

18" x 5" x 4.5"

Weight

3 lb

Installed Height

4.5"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Commander Flush Mount 29"



SKU: 60630



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

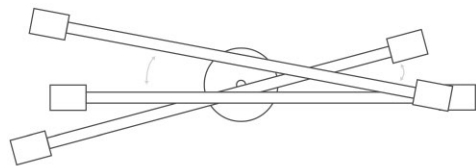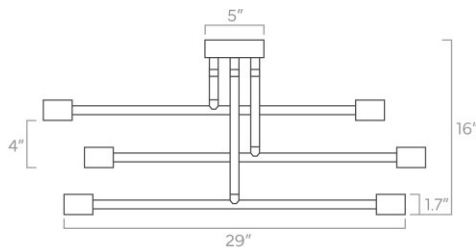

Dimensions

29" x 1.7" x 1.7" (3 rotatable tiers)

Weight

8 lb

Installed Height

16"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Commander Flush Mount 47"


SKU: 60631



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

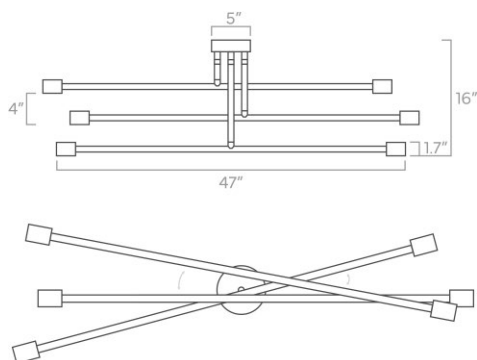

Dimensions

47" x 1.7" x 1.7" (3 rotatable tiers)

Weight

10 lb

Installed Height

16"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Vogue 7 Flush Mount


SKU: 60730



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

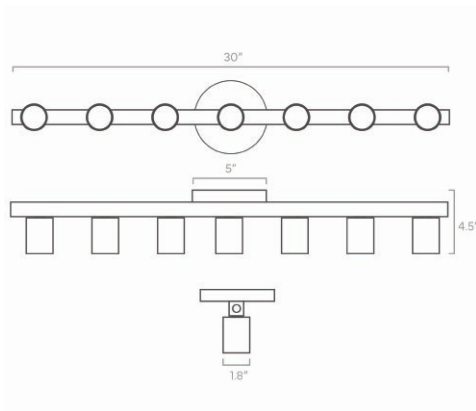

Dimensions

30" x 5" x 4.5"

Weight

4 lb

Installed Height

4.5"

Rating

- (7) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Bling Flush Mount

SKU: 70110F




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

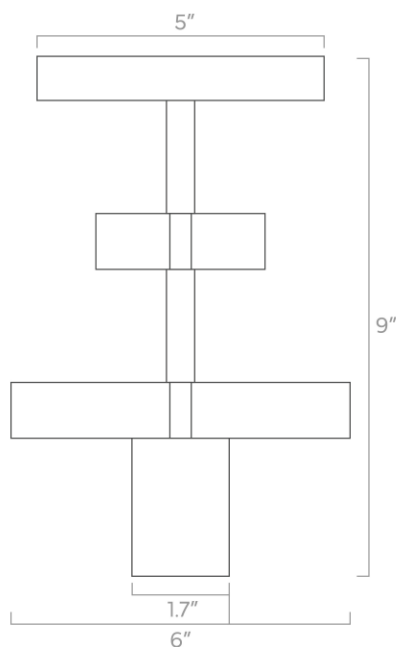

Dimensions

9" x Ø6"

Weight

1 lb

Installed Height

9"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Acrylic
- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lepore Flush Mount


SKU: 70130



Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

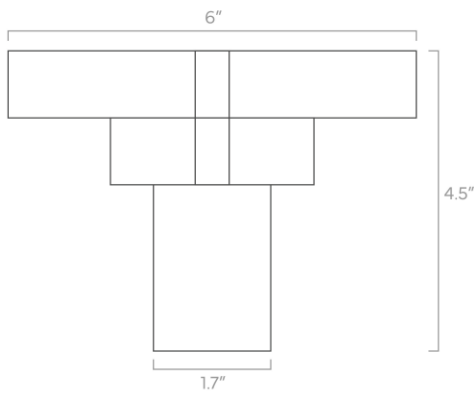

Dimensions

4.5" x Ø6"

Weight

1 lb

Installed Height

4.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Acrylic
- Aluminum
- Brass

Engage



duttonbrown.com/engage