


Urchin Chandelier 20"

SKU: 10401-20

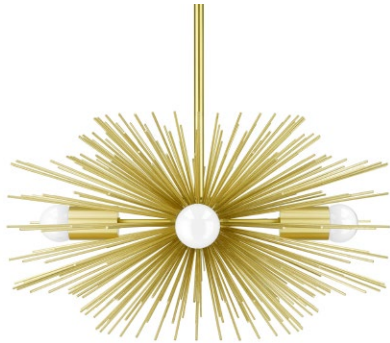


Finish Options

 Brass

Color Options

None

duttonbrown.com/finishes

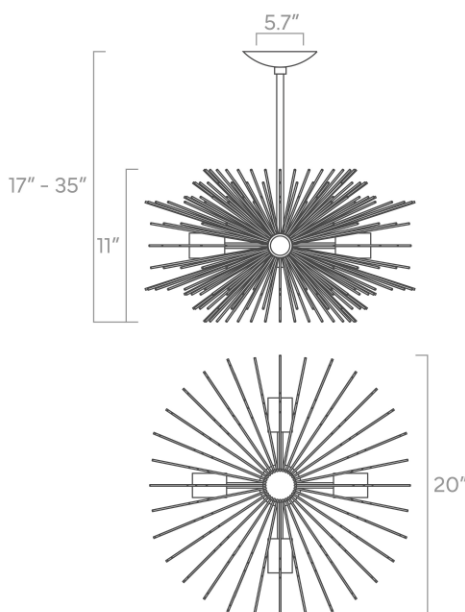

Dimensions

20" x 20" x 11"

Weight

10 lb

Installed Height

17" - 35"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Urchin Chandelier 27"

SKU: 10401-27

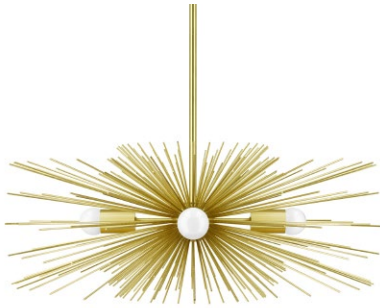


Finish Options

 Brass

Color Options

None

duttonbrown.com/finishes

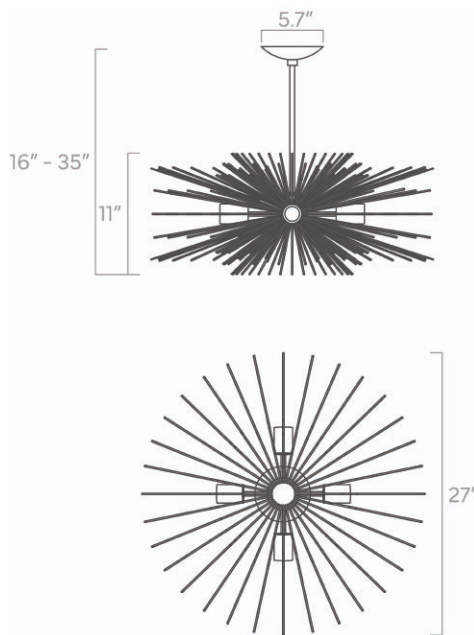

Dimensions

27" x 27" x 11"

Weight

11 lb

Installed Height

17" - 35"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Beaded Urchin Chandelier 20"

SKU: 10403-20

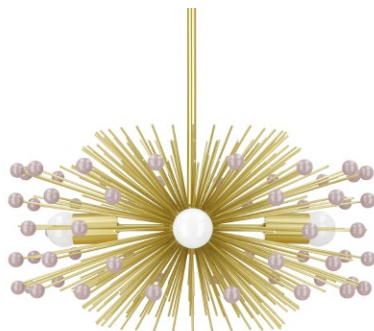


Finish Options

 Brass

Color Options

 White	 Ochre
 Bone	 Orange
 Spa	 Riding Hood Red
 Python Green	 Barely
 Lagoon	 Chalk
 Cobalt	 Black
 Slate Blue	

duttonbrown.com/finishes

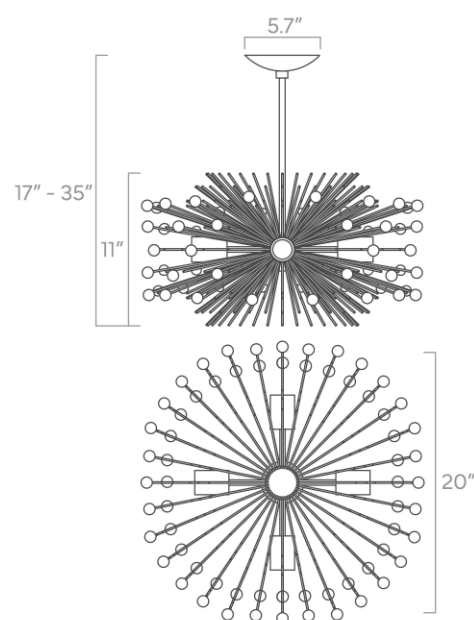

Dimensions

20" x 20" x 11"

Weight

12 lb

Installed Height

17" - 35"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Beaded Urchin Chandelier 27"

SKU: 10403-27

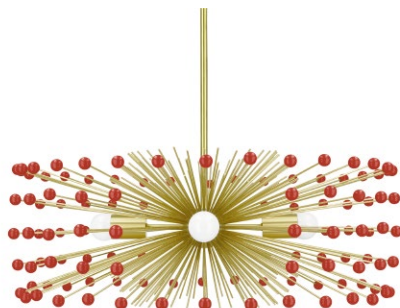


Finish Options

● Brass

Color Options

○ White	● Ochre
● Bone	● Orange
● Spa	● Riding Hood Red
● Python Green	● Barely
● Lagoon	● Chalk
● Cobalt	● Black
● Slate Blue	

duttonbrown.com/finishes

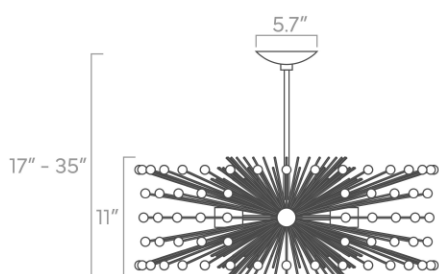

Dimensions


27" x 27" x 11"

Weight

14 lb

Installed Height

17" - 35"

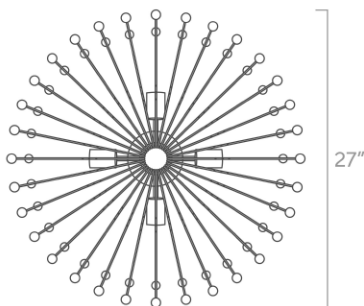

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Elliptical Sputnik Chandelier

SKU: 21800




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

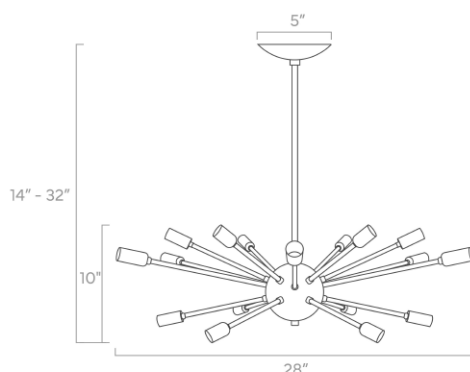

Dimensions

28" x 28" x 10"

Weight

5 lb

Installed Height

14" - 32"

Rating

- (18) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada.



Engage



duttonbrown.com/engage

Orbi Chandelier

SKU: 30402




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

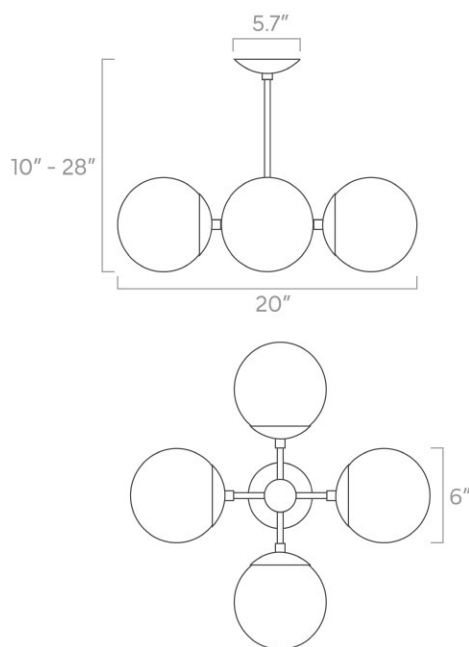

Dimensions

20" x 20" x 6"

Weight

7 lb

Installed Height

10" - 28"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Big Orbi Chandelier

SKU: 30403




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

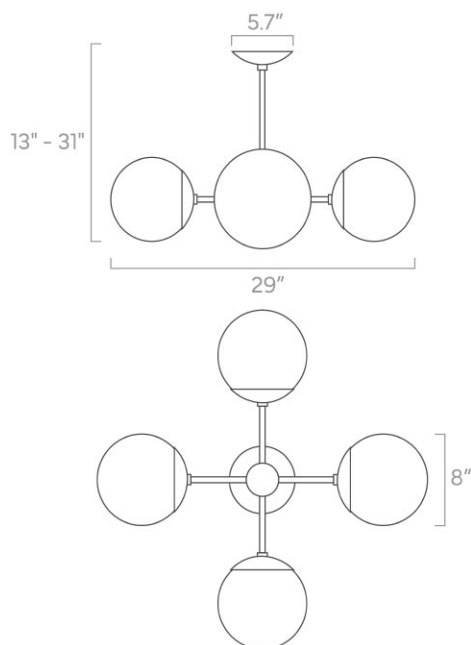

Dimensions

29" x 29" x 8"

Weight

10 lb

Installed Height

13" - 31"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Tetra Chandelier

SKU: 30404




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

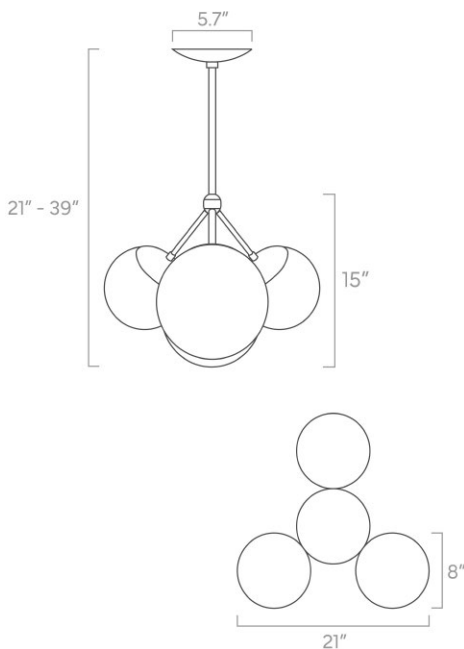

Dimensions

21" x 21" x 15"

Weight

9 lb

Installed Height

21" - 39"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Status Chandelier

SKU: 30405

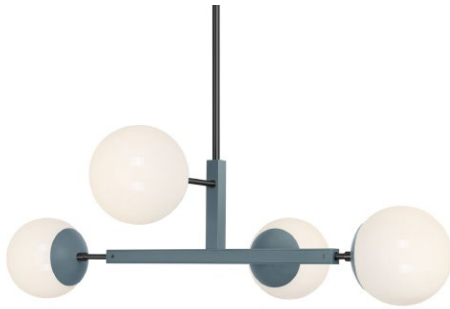

Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

Dimensions

35" x 23" x 11"

Weight

7 lb

Installed Height

16" - 34"

Configuration


- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Aluminum
- Brass
- Opal glass

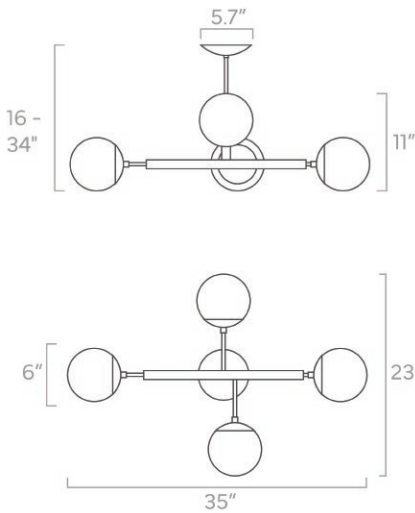

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Big Status Chandelier

SKU: 30407

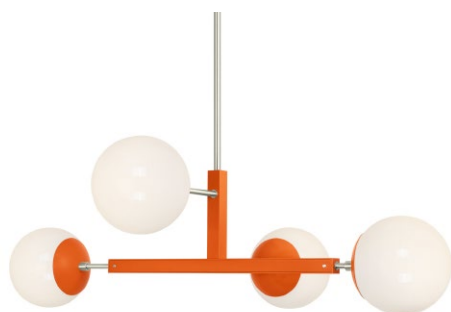

Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

Dimensions

42" x 26" x 13"

Weight

12 lb

Installed Height

17" - 35"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Engage



duttonbrown.com/engage

Prisma Chandelier

SKU: 30502




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

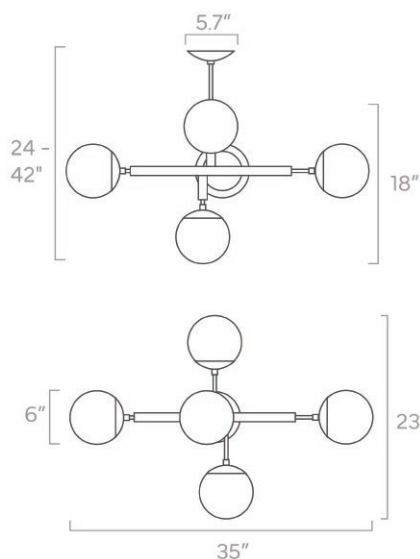

Dimensions

35" x 23" x 18"

Weight

8 lb

Installed Height

24" - 42"

Rating

- (5) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Big Prisma Chandelier

SKU: 30503




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

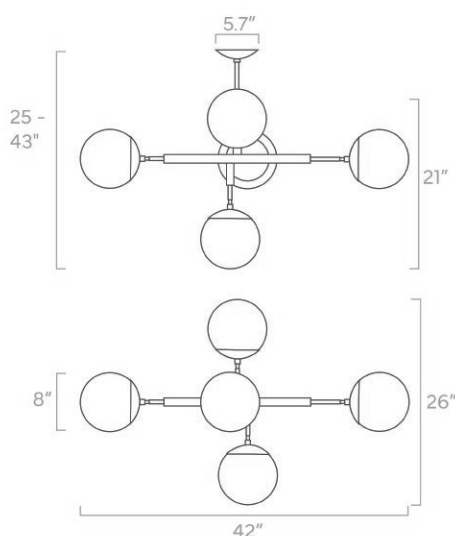

Dimensions

42" x 26" x 21"

Weight

15 lb

Installed Height

25" - 43"

Rating

- (5) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Axia Chandelier

SKU: 30605




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

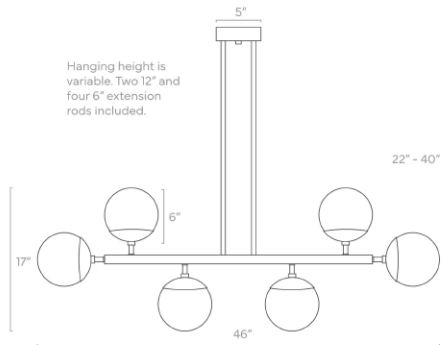

Dimensions

46" x 6" x 17"

Weight

12 lb

Installed Height

22" - 40"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (2) 12" + (4) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Big Axia Chandelier

SKU: 30606

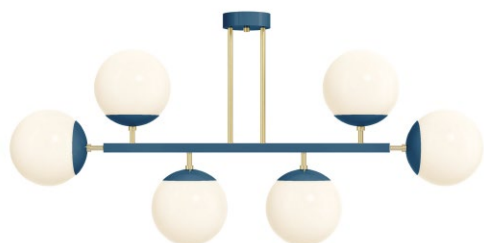

Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

Dimensions

50" x 8" x 21"

Weight

17 lb

Installed Height


24" - 42"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (2) 12" + (4) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

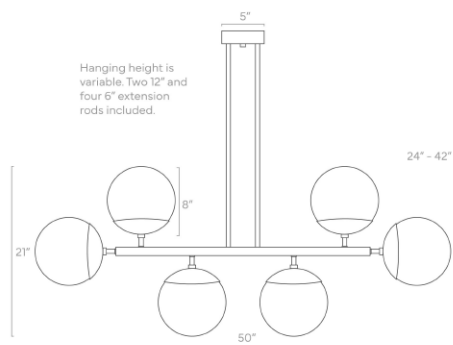

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Crown Chandelier 32"

SKU: 31000





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

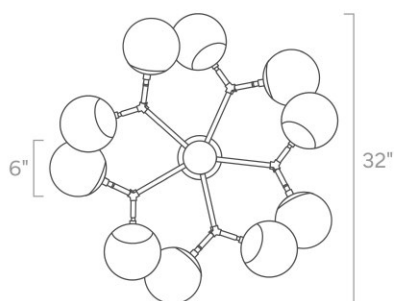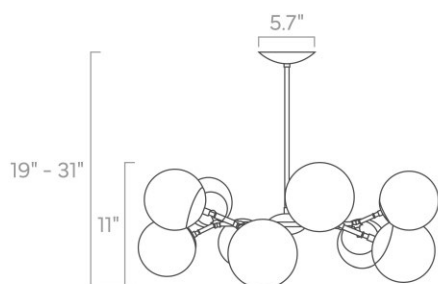

Dimensions

32" x 32" x 11"

Weight

16 lb

Installed Height

19" - 31"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Crown Chandelier 46"

SKU: 31001

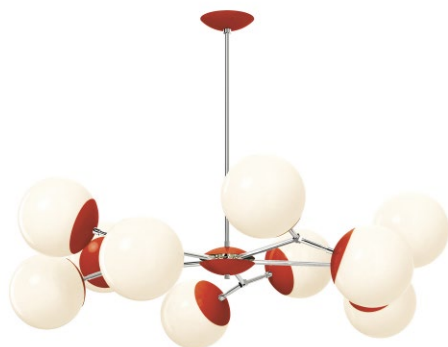


Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

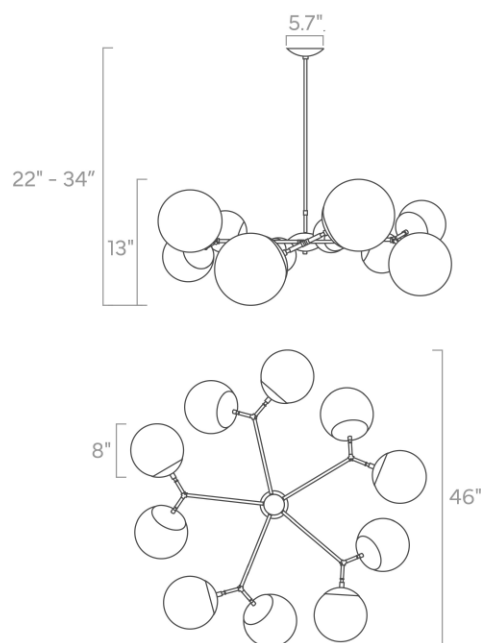

Dimensions

46" x 46" x 13"

Weight

20 lb

Installed Height

22" - 34"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Alegria Chandelier

SKU: 51000




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

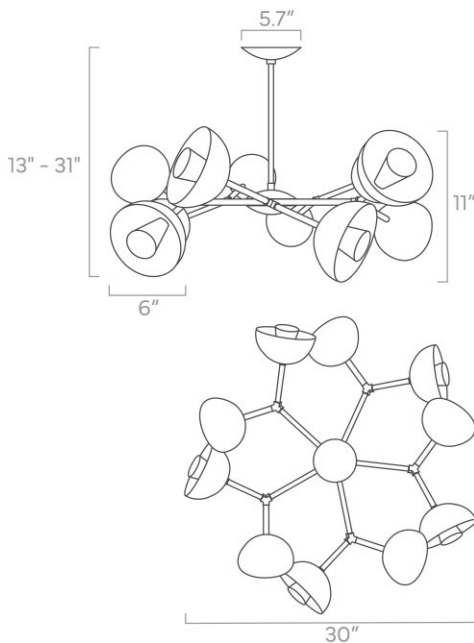

Dimensions

30" x 30" x 11"

Weight

12 lb

Installed Height

13" - 31"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Captain Chandelier 29"



SKU: 60400



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

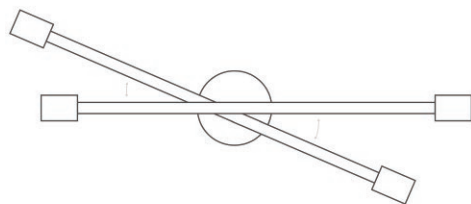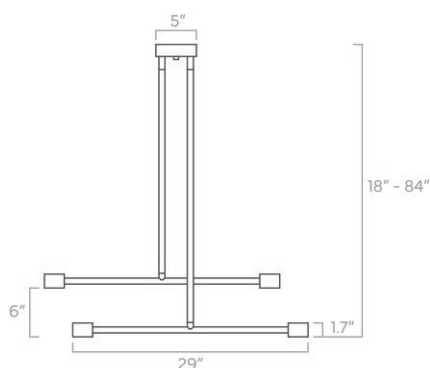

Dimensions

29" x 1.7" x 1.7" (2 rotatable tiers)

Weight

Variable

Installed Height

18", 24", 36", 48", 60", 72", or 84"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Captain Chandelier 47"



SKU: 60401



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

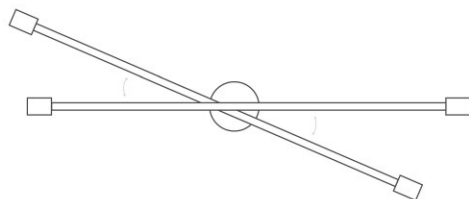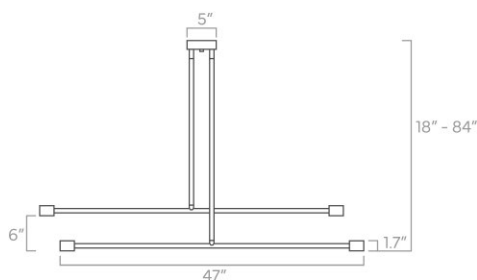

Dimensions

47" x 1.7" x 1.7" (2 rotatable tiers)

Weight

Variable

Installed Height

18", 24", 36", 48", 60", 72", or 84"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Commander Chandelier 29"


SKU: 60600

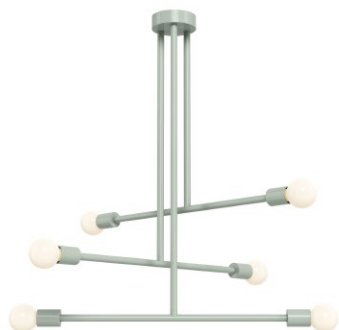

Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

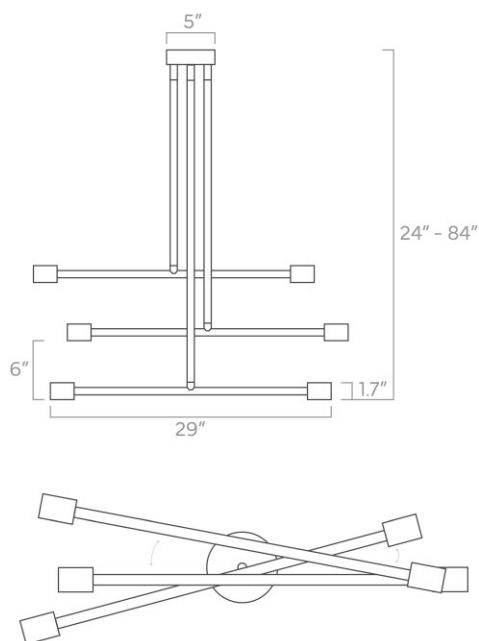

Dimensions

29" x 1.7" x 1.7" (3 rotatable tiers)

Weight

Variable

Installed Height

24", 36", 48", 60", 72", and 84"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Commander Chandelier 47"



SKU: 60601

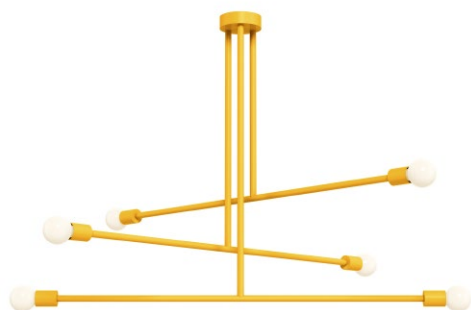

Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

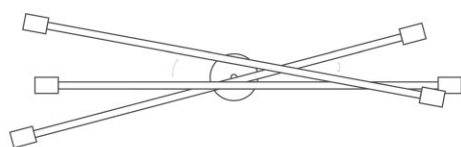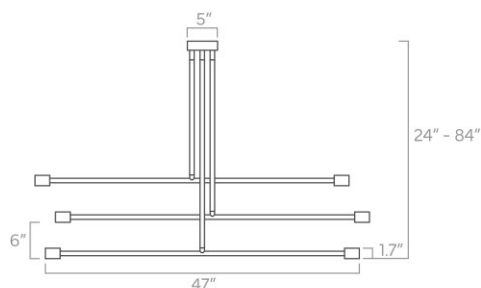

Dimensions

47" x 1.7" x 1.7" (3 rotatable tiers)

Weight

Variable

Installed Height

24", 36", 48", 60", 72", and 84"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage