


Urchin Chandelier 20"

SKU: 10401-20

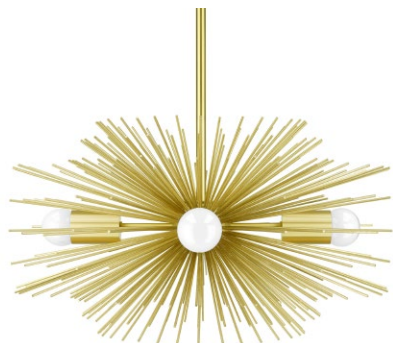


Finish Options

 Brass

Color Options

None

duttonbrown.com/finishes

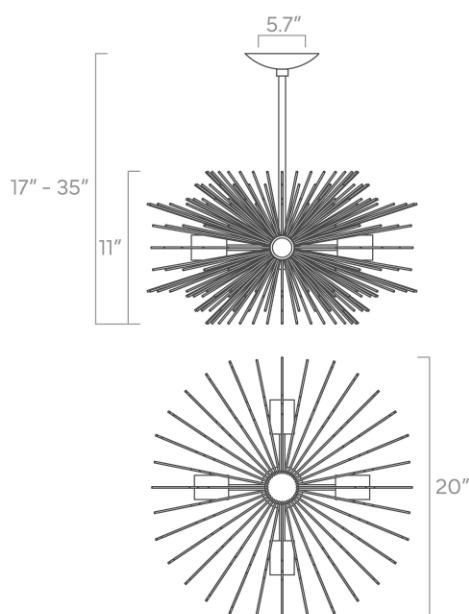

Dimensions

20" x 20" x 11"

Weight

10 lb

Installed Height

17" - 35"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Urchin Chandelier 27"

SKU: 10401-27

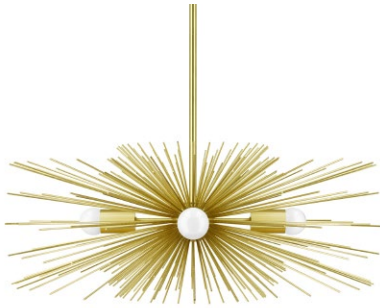


Finish Options

 Brass

Color Options

None

duttonbrown.com/finishes

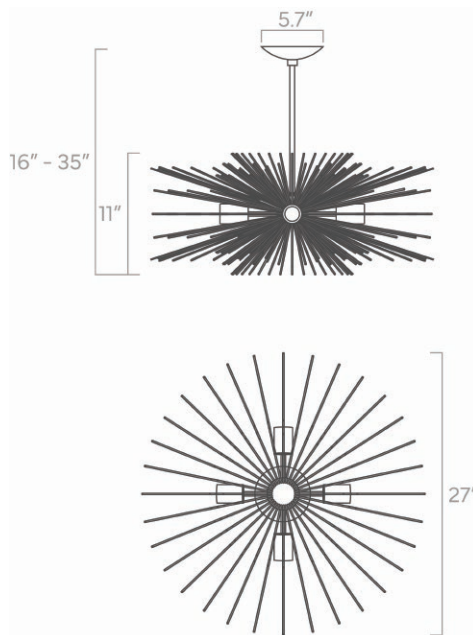

Dimensions

27" x 27" x 11"

Weight

11 lb

Installed Height

17" - 35"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Beaded Urchin Flush Mount 20"

SKU: 10403F-20





Finish Options

 Brass

Color Options

 White	 Ochre
 Bone	 Orange
 Spa	 Riding Hood Red
 Python Green	 Barely
 Lagoon	 Chalk
 Cobalt	 Black
 Slate Blue	 Black

duttonbrown.com/finishes

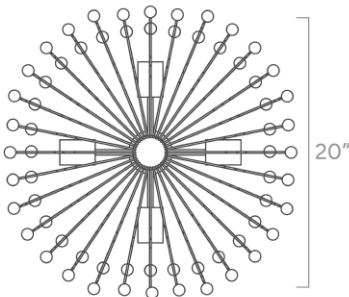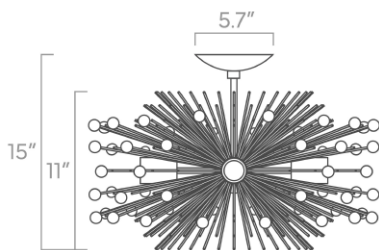

Dimensions

20" x 20" x 11"

Weight

12 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass


Engage



duttonbrown.com/engage

Beaded Urchin Chandelier 27"

SKU: 10403-27

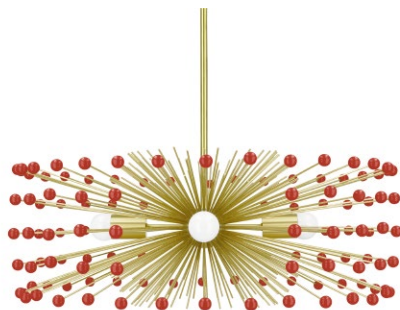


Finish Options

 Brass

Color Options

 White	 Ochre
 Bone	 Orange
 Spa	 Riding Hood Red
 Python Green	 Barely
 Lagoon	 Chalk
 Cobalt	 Black
 Slate Blue	

duttonbrown.com/finishes

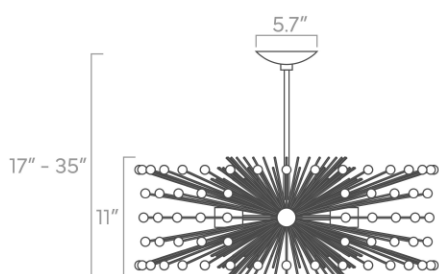

Dimensions


27" x 27" x 11"

Weight

14 lb

Installed Height

17" - 35"

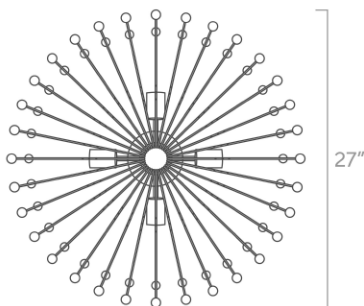

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Elliptical Sputnik Chandelier

SKU: 21800




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

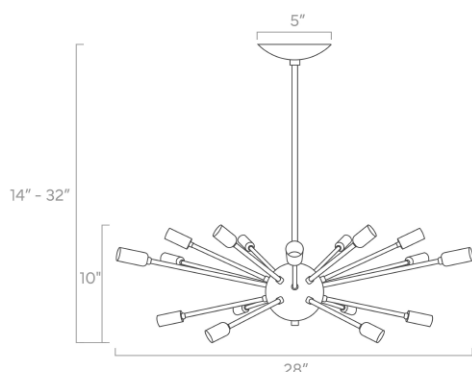

Dimensions

28" x 28" x 10"

Weight

5 lb

Installed Height

14" - 32"

Rating

- (18) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada.



Engage



duttonbrown.com/engage

Orbi Chandelier

SKU: 30402




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

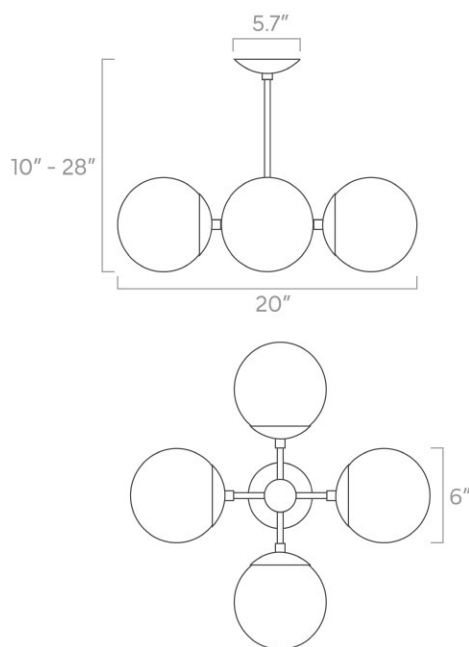

Dimensions

20" x 20" x 6"

Weight

7 lb

Installed Height

10" - 28"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Big Orbi Chandelier

SKU: 30403




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

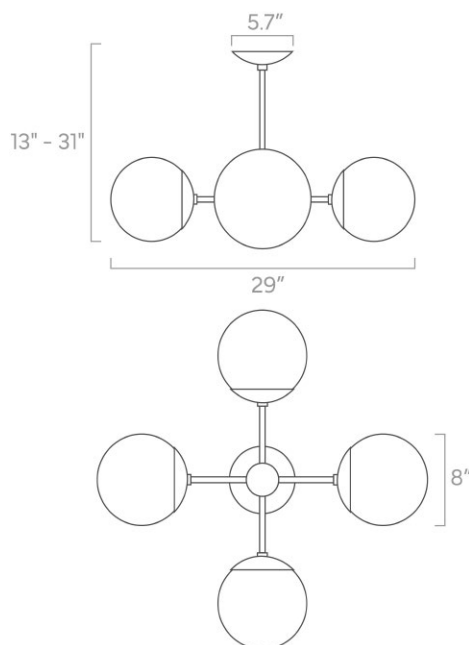

Dimensions

29" x 29" x 8"

Weight

10 lb

Installed Height

13" - 31"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Tetra Chandelier

SKU: 30404




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

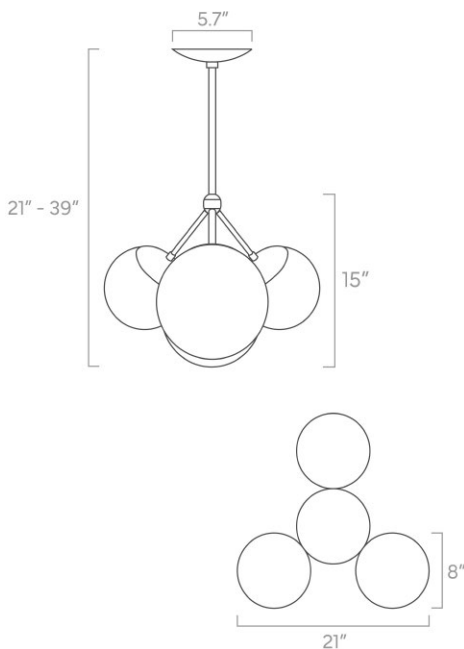

Dimensions

21" x 21" x 15"

Weight

9 lb

Installed Height

21" - 39"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Status Chandelier

SKU: 30405

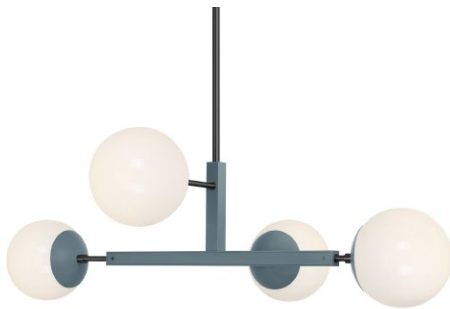

Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

Dimensions

35" x 23" x 11"

Weight

7 lb

Installed Height


16" - 34"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

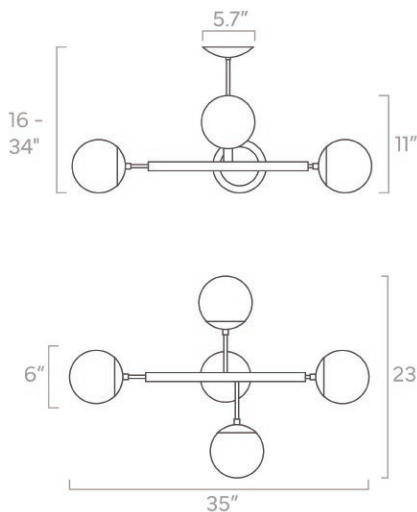

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Big Status Chandelier

SKU: 30407

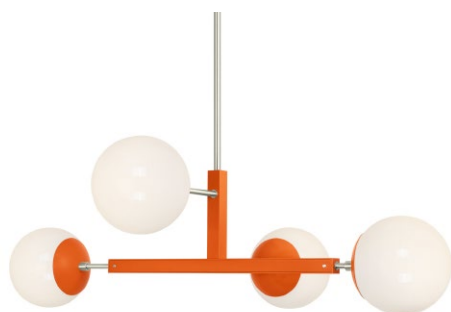

Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

Dimensions

42" x 26" x 13"

Weight

12 lb

Installed Height

17" - 35"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Prisma Chandelier

SKU: 30502




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

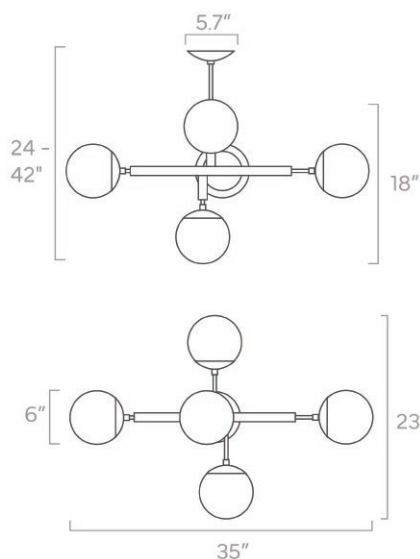

Dimensions

35" x 23" x 18"

Weight

8 lb

Installed Height

24" - 42"

Rating

- (5) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Big Prisma Chandelier

SKU: 30503




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

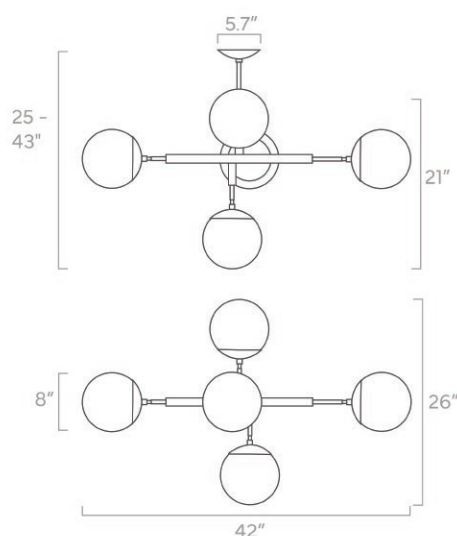

Dimensions

42" x 26" x 21"

Weight

15 lb

Installed Height

25" - 43"

Rating

- (5) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Axia Chandelier

SKU: 30605




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

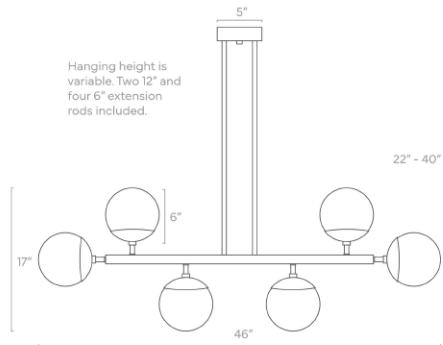

Dimensions

46" x 6" x 17"

Weight

12 lb

Installed Height

22" - 40"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (2) 12" + (4) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Big Axia Chandelier

SKU: 30606

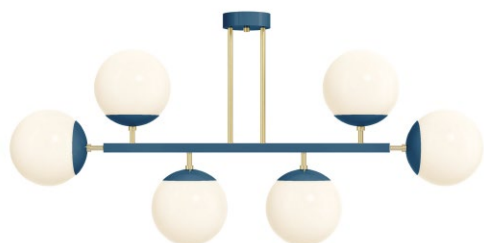

Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

Dimensions

50" x 8" x 21"

Weight

17 lb

Installed Height


24" - 42"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (2) 12" + (4) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass
- Opal glass

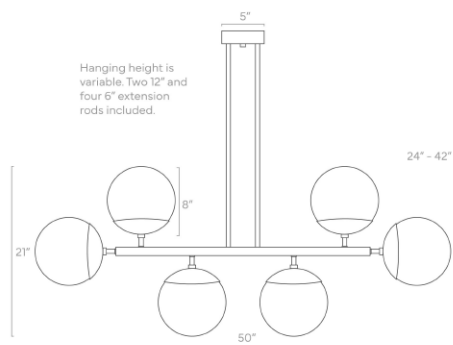

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Crown Chandelier 32"

SKU: 31000





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

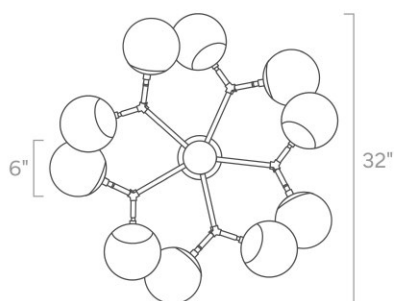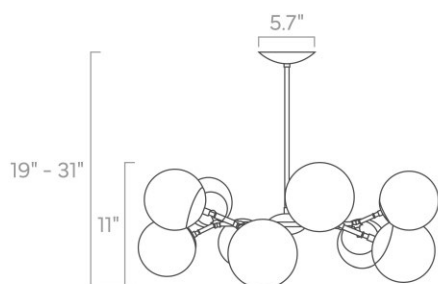

Dimensions

32" x 32" x 11"

Weight

16 lb

Installed Height

19" - 31"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass


Engage



duttonbrown.com/engage

Crown Chandelier 46"

SKU: 31001

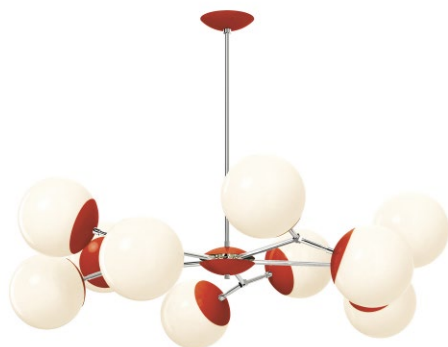


Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

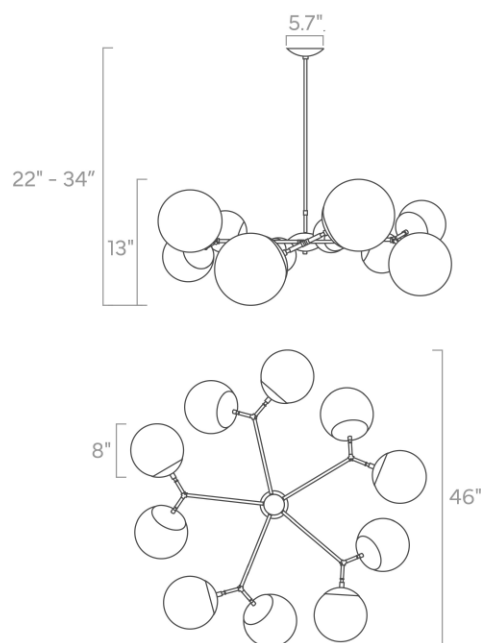

Dimensions

46" x 46" x 13"

Weight

20 lb

Installed Height

22" - 34"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Alegria Chandelier

SKU: 51000




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

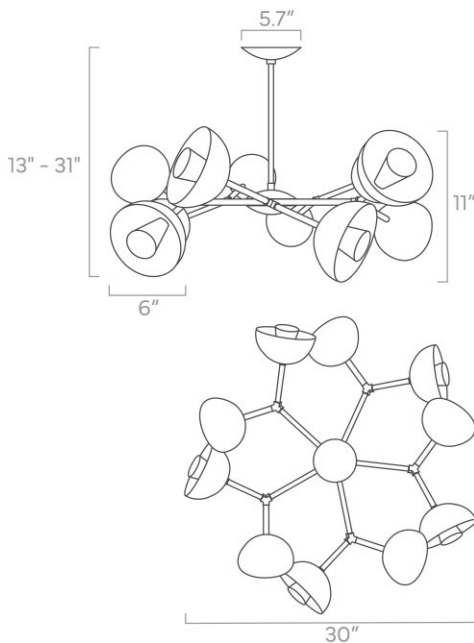

Dimensions

30" x 30" x 11"

Weight

12 lb

Installed Height

13" - 31"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes (1) 12" + (2) 6" rods to vary installed height. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Captain Chandelier 29"



SKU: 60400



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

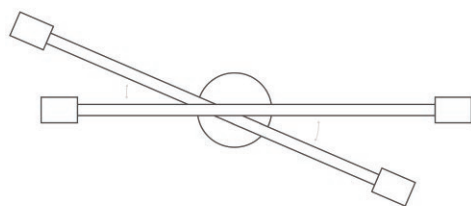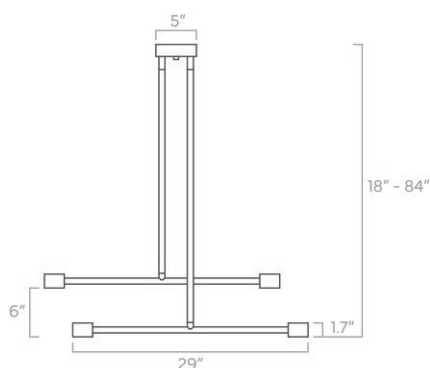

Dimensions

29" x 1.7" x 1.7" (2 rotatable tiers)

Weight

Variable

Installed Height

18", 24", 36", 48", 60", 72", or 84"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Captain Chandelier 47"



SKU: 60401



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

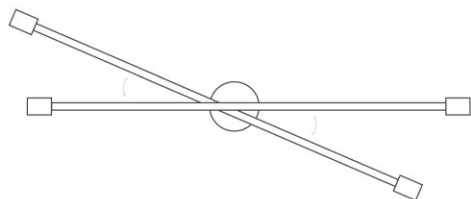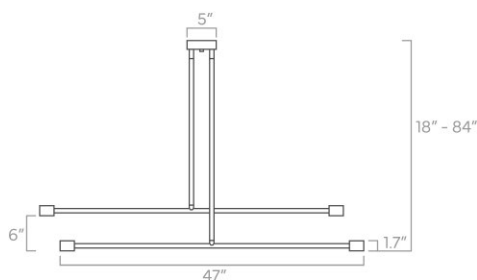

Dimensions

47" x 1.7" x 1.7" (2 rotatable tiers)

Weight

Variable

Installed Height

18", 24", 36", 48", 60", 72", or 84"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Commander Chandelier 29"


SKU: 60600

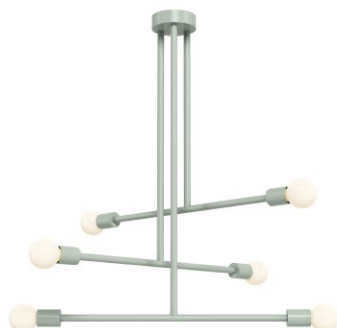

Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

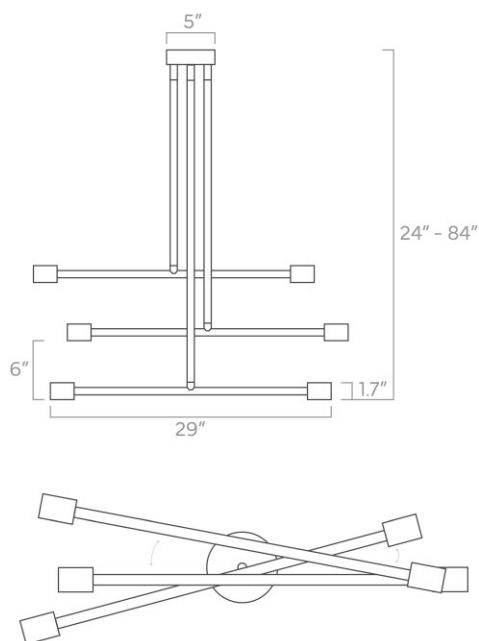

Dimensions

29" x 1.7" x 1.7" (3 rotatable tiers)

Weight

Variable

Installed Height

24", 36", 48", 60", 72", and 84"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.




Engage



duttonbrown.com/engage

Commander Chandelier 47"



SKU: 60601

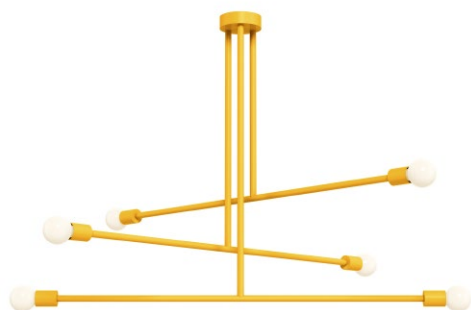

Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

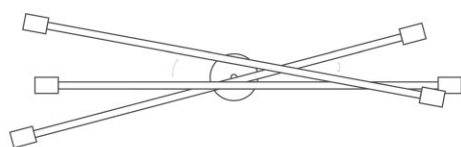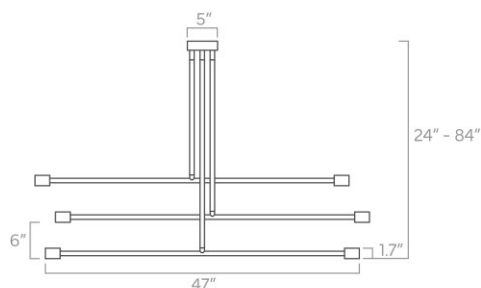

Dimensions

47" x 1.7" x 1.7" (3 rotatable tiers)

Weight

Variable

Installed Height

24", 36", 48", 60", 72", and 84"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified heights. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Cap Pendant 6"

SKU: 30110-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

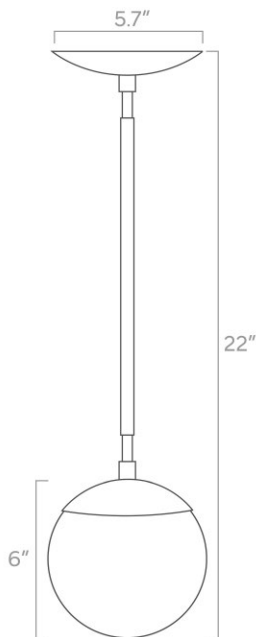

Dimensions

22" x Ø6"

Weight

1 lb

Installed Height

22"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cap Pendant 8"

SKU: 30110-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

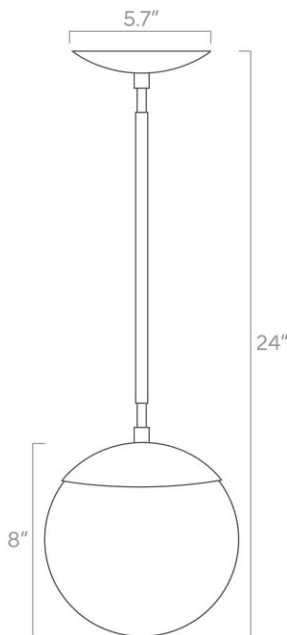

Dimensions

24" x Ø8

Weight

2 lb

Installed Height

24"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cap Pendant 10"

SKU: 30110-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

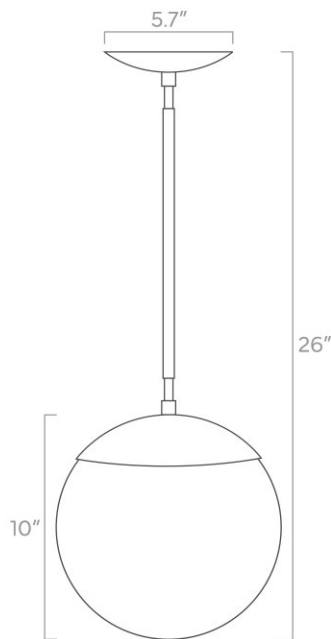

Dimensions

26" x Ø10"

Weight

3 lb

Installed Height

26"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cap Pendant 12"

SKU: 30110-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

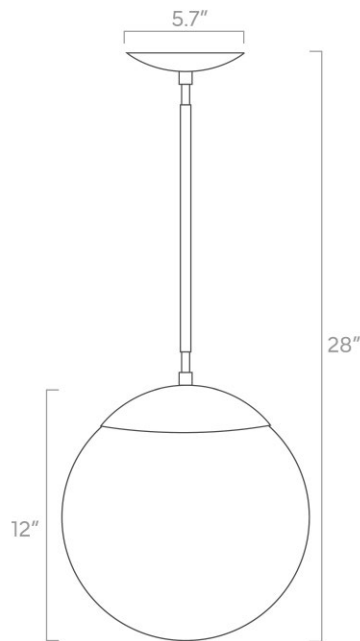

Dimensions

28" x Ø12"

Weight

4 lb

Installed Height

28"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 6"

SKU: 30112-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

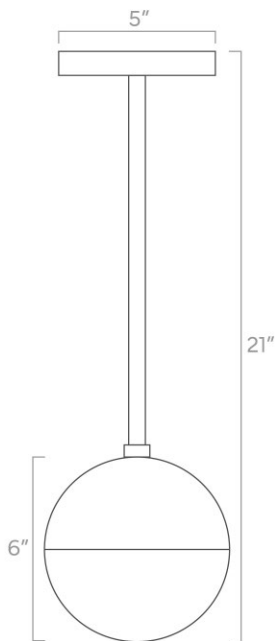

Dimensions

21" x Ø6"

Weight

2 lb

Installed Height

21"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 8"

SKU: 30112-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

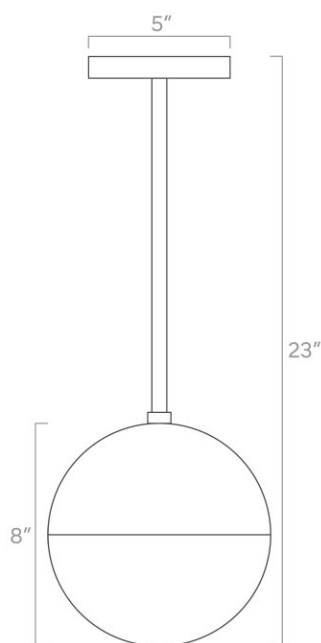

Dimensions

23" x Ø8"

Weight

3 lb

Installed Height

23"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 10"

SKU: 30112-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

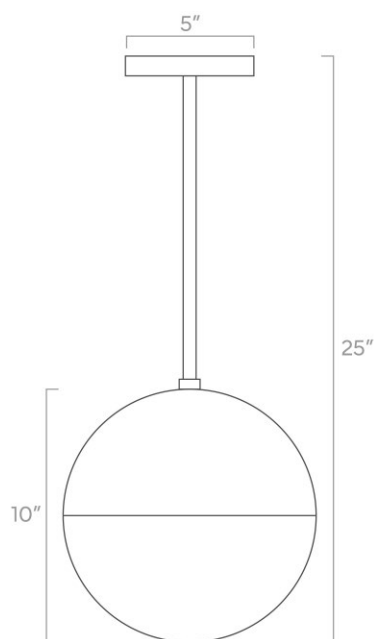

Dimensions

25" x Ø10"

Weight

4 lb

Installed Height

25"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 12"

SKU: 30112-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

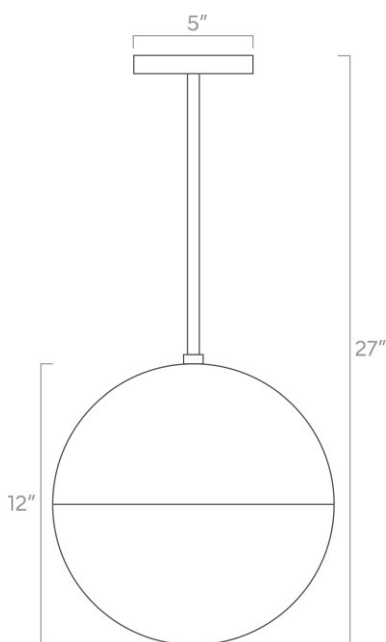

Dimensions

27" x Ø12"

Weight

5 lb

Installed Height

27"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Maxo Pendant 8"

SKU: 40111-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

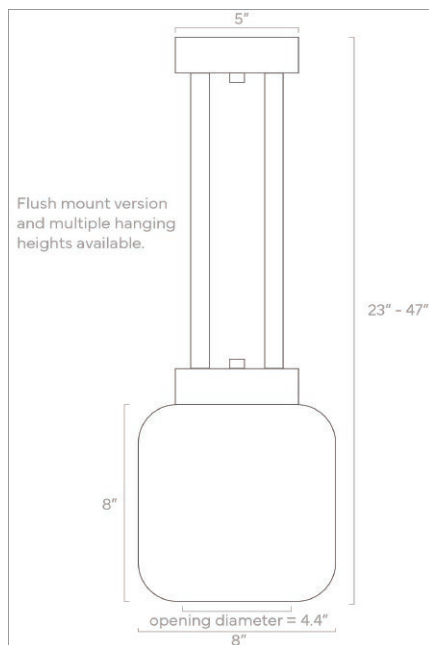

Dimensions

Variable x Ø8"

Weight

3 lb

Installed Height

23", 35", 47" (variable)

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Shade installs via 1-5/8" UNO hole/thread

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Maxo Pendant 13"

SKU: 40111-13




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

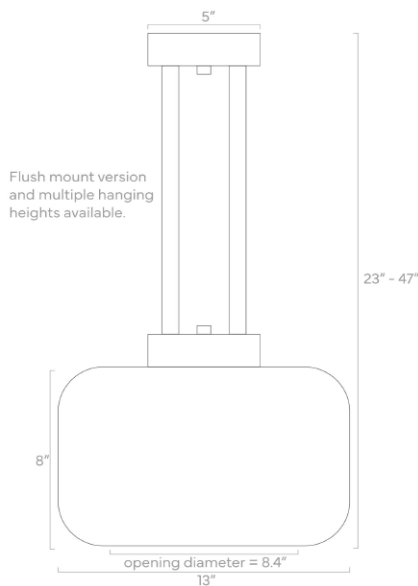

Dimensions

Variable x Ø13"

Weight

4 lb

Installed Height

23", 35", 47" (variable)

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Shade installs via 1-5/8" UNO hole/thread

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cadbury Pendant 8"

SKU: 50110-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

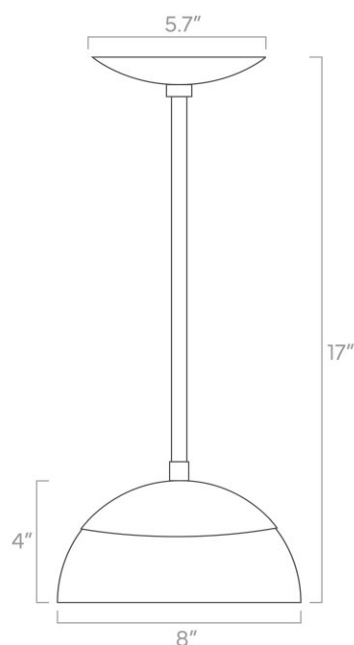

Dimensions

17" x Ø8"

Weight

2 lb

Installed Height

17"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cadbury Pendant 10"

SKU: 50110-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

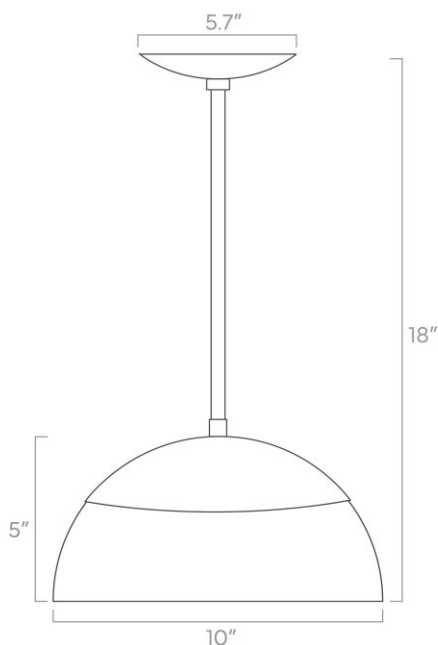

Dimensions

18" x Ø10"

Weight

3 lb

Installed Height

18"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cadbury Pendant 12"

SKU: 50110-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

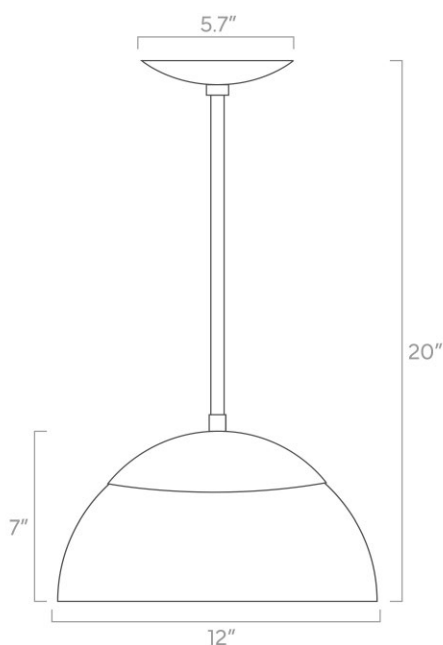

Dimensions

20" x Ø12"

Weight

4 lb

Installed Height

20"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Echo Pendant 8"

SKU: 50111-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

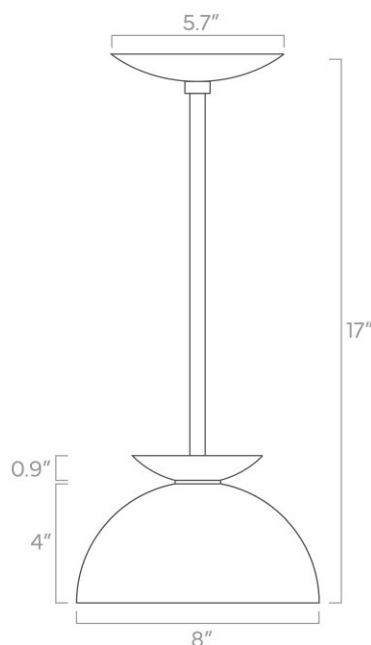

Dimensions

17" x Ø8"

Weight

2 lb

Installed Height

17"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Echo Pendant 10"

SKU: 50111-10




Finish Options

-  Brass
-  Nickel
-  Black

Color Options

- | | |
|--|---|
|  White |  Ochre |
|  Bone |  Orange |
|  Spa |  Riding Hood Red |
|  Python Green |  Barely |
|  Lagoon |  Chalk |
|  Cobalt |  Black |
|  Slate Blue | |

duttonbrown.com/finishes

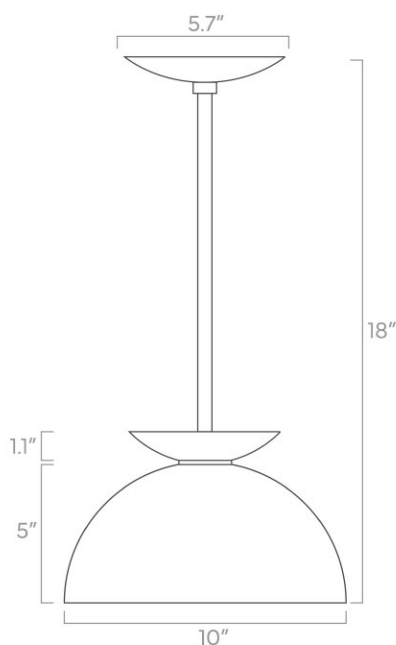

Dimensions

18" x Ø10"

Weight

3 lb

Installed Height

18"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Echo Pendant 12"

SKU: 50111-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

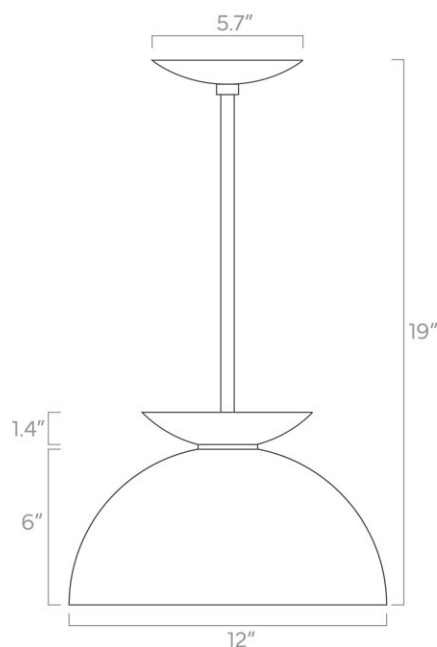

Dimensions

19" x Ø12"

Weight

3 lb

Installed Height

19"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Reader Pendant

SKU: 60110




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

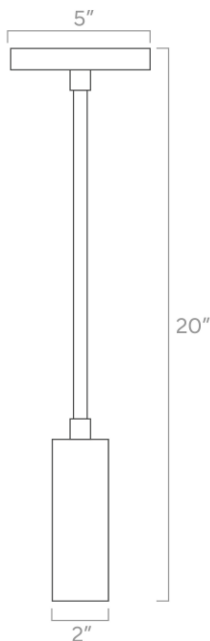

Dimensions

20" x Ø5"

Weight

2 lb

Installed Height

20"

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engagew



duttonbrown.com/engage

Eureka Pendant

SKU: 60111




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

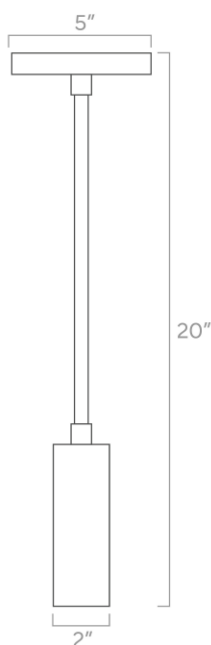

Dimensions

20" x Ø5"

Weight

2 lb

Installed Height

20"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Twink Pendant

SKU: 60112



Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes



Dimensions

15" x Ø5"

Weight

1 lb

Installed Height

15"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Pilot Pendant 29"


SKU: 60210



Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

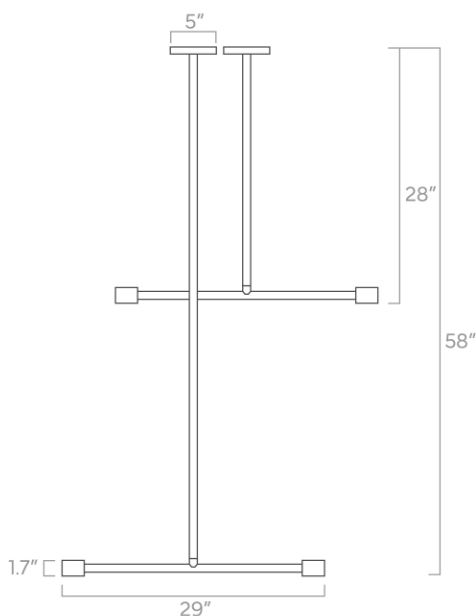

Dimensions

29" x 1.7" x 1.7"

Weight

Variable

Installed Height

28", 34", 40", 46", 52" or 58"

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Pilot Pendant 47"


SKU: 60211



Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

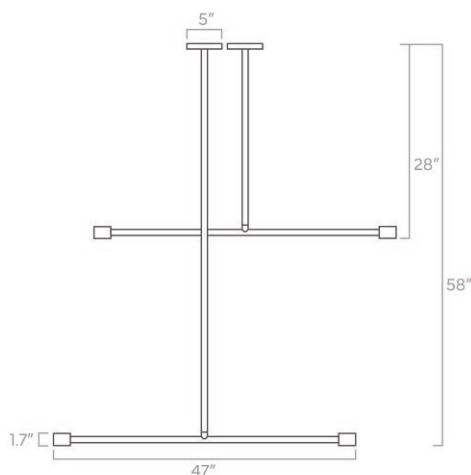

Dimensions

47" x 1.7" x 1.7"

Weight

Variable

Installed Height

28", 34", 40", 46", 52" or 58"

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Bling Pendant

SKU: 70110




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

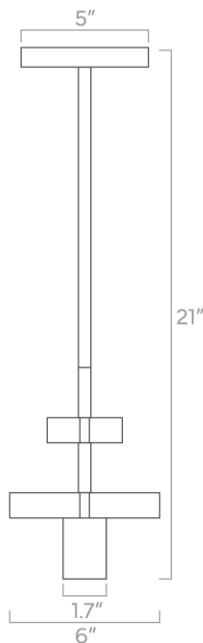

Dimensions

21" x Ø6"

Weight

2 lb

Installed Height

21"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Acrylic
- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Sputnik Sconce

SKU: 20620





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

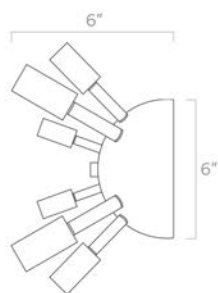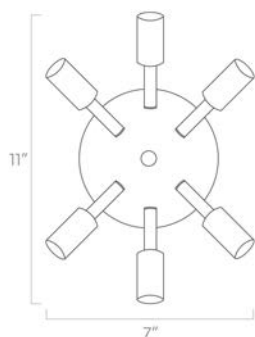

Dimensions

11" x 7" x 6"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Rating

- (6) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Sconce 6"

SKU: 30120




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

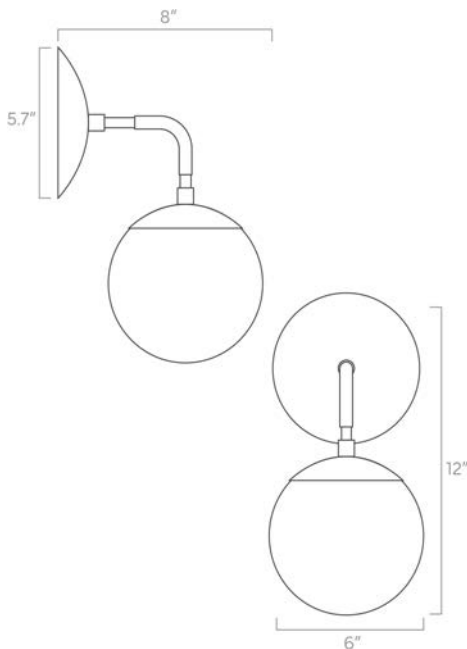

Dimensions

12" x 6" x 8"

Weight

1 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)
- Energy efficiency relabeling available by request

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Sconce 8"

SKU: 30121




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

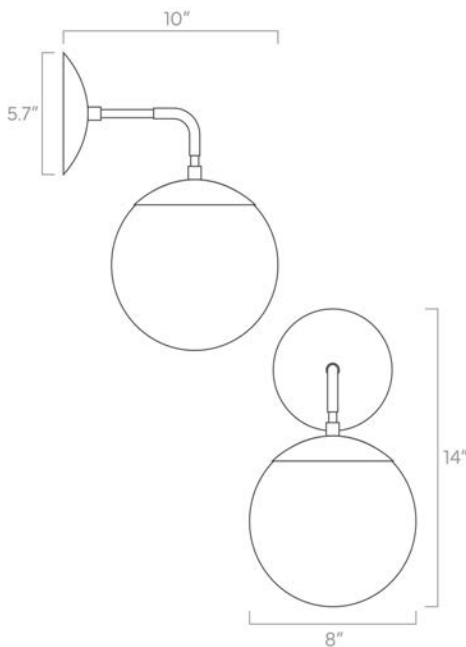

Dimensions

14" x 8" x 10"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Double Sconce 6"

SKU: 30220




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

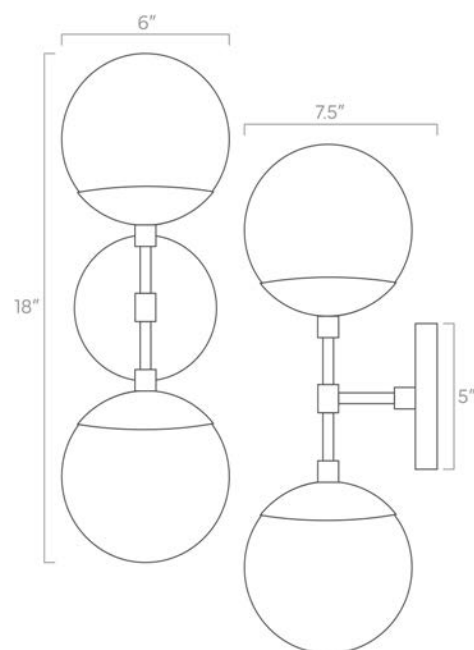

Dimensions

18" x 6" x 7.5"

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)
- Energy efficiency relabeling available by request

Materials

- Brass
- Glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Double Sconce 8"

SKU: 30221




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

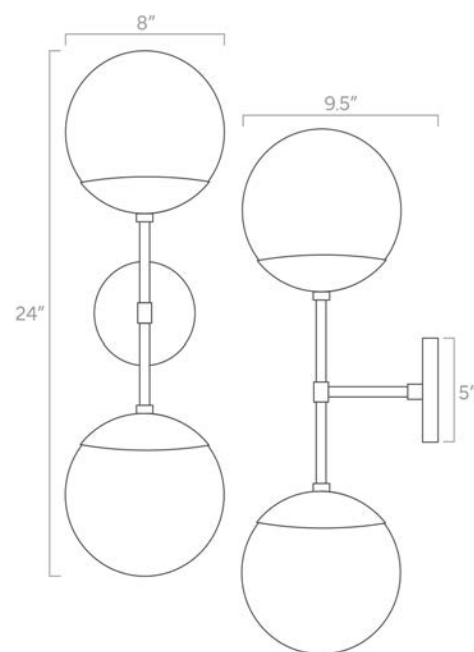

Dimensions

24" x 8" x 9.5"

Weight

4 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Brass
- Opal glass

Engage



duttonbrown.com/engage

Visage Sconce

SKU: 30222




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

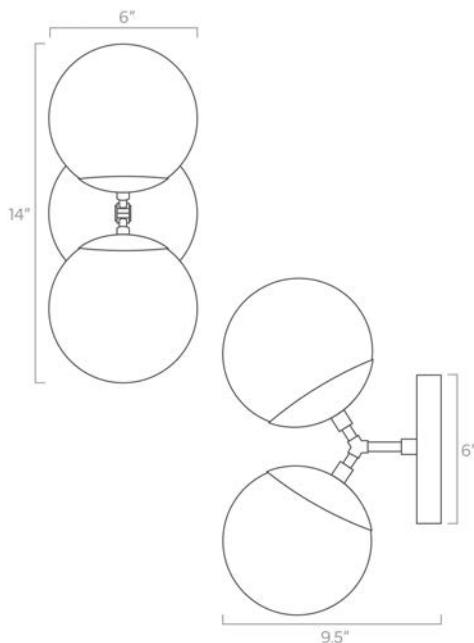

Dimensions

14" x 6" x 9.5"

Weight

4 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Acrylic
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Legend 2 Sconce

SKU: 30223




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

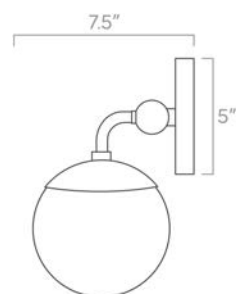

Dimensions


17" x 10.5" x 7.5"

Weight

4 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

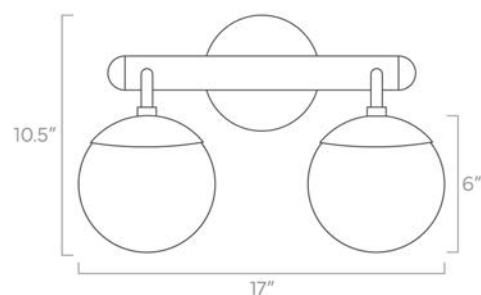

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Icon 2 Sconce

SKU: 30224




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

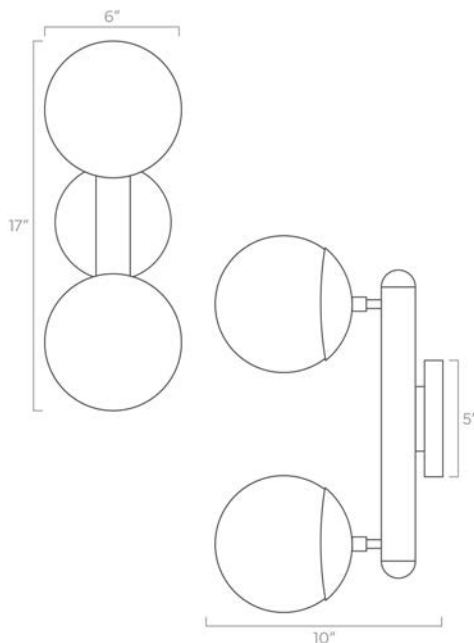

Dimensions

17" x 6" x 10"

Weight

4 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Legend 3 Sconce

SKU: 30320




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

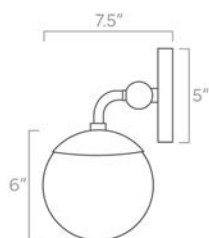

Dimensions


23" x 10.5" x 7.5"

Weight

5 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

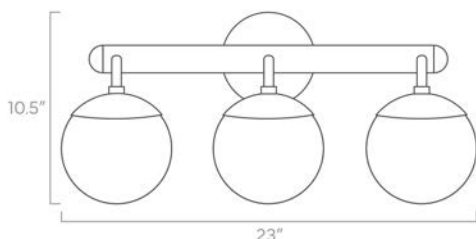

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Icon 3 Sconce

SKU: 30321




Finish Options

-  Brass
-  Nickel
-  Black

Color Options

- | | |
|--|---|
|  White |  Ochre |
|  Bone |  Orange |
|  Spa |  Riding Hood Red |
|  Python Green |  Barely |
|  Lagoon |  Chalk |
|  Cobalt |  Black |
|  Slate Blue | |

duttonbrown.com/finishes

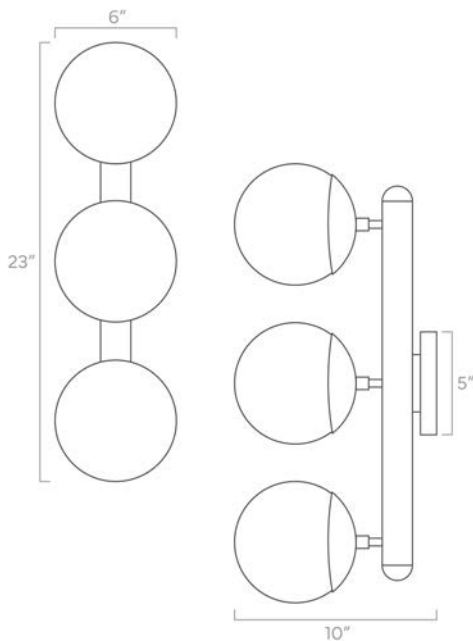

Dimensions

23" x 6" x 10"

Weight

5 lb

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Sconce - No Arm

SKU: 40120-0




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

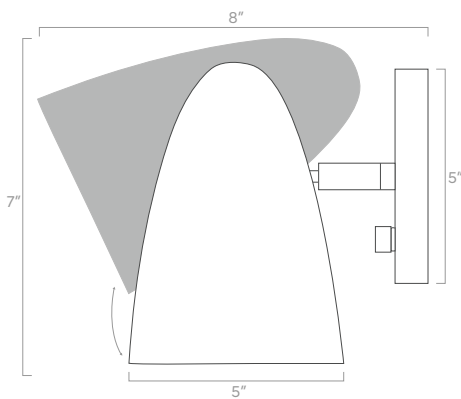

Dimensions

7" x 5" x 8"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada




Engage



duttonbrown.com/engage

Boom Sconce - 3" Arm

SKU: 40120-3

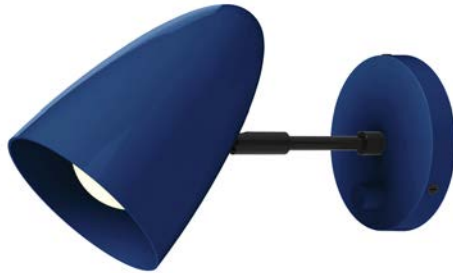


Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

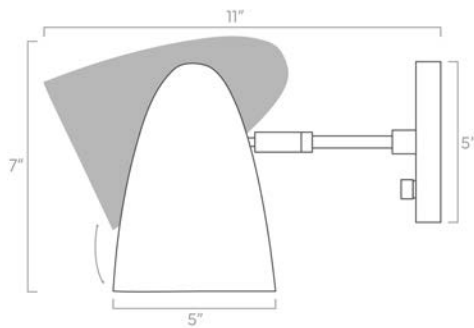

Dimensions

7" x 5" x 11"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Sconce - 6" Arm

SKU: 40120-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

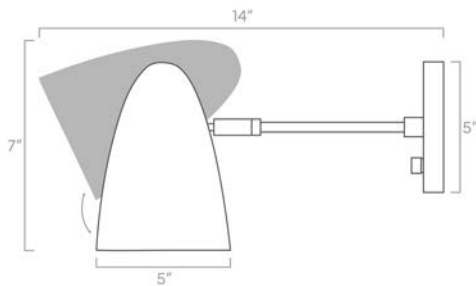

Dimensions

7" x 5" x 14"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Sconce - 10" Arm

SKU: 40120-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

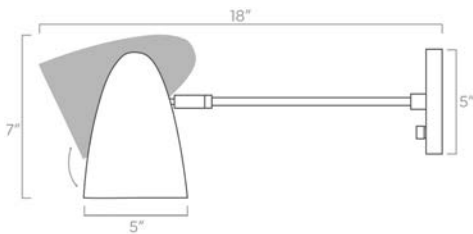

Dimensions

7" x 5" x 18"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Swing Arm Sconce - 9" Arm

SKU: 40121-9



Finish Options

-  Brass
-  Nickel
-  Black

Color Options

- | | |
|--|---|
|  White |  Ochre |
|  Bone |  Orange |
|  Spa |  Riding Hood Red |
|  Python Green |  Barely |
|  Lagoon |  Chalk |
|  Cobalt |  Black |
|  Slate Blue | |

duttonbrown.com/finishes

Dimensions

15" radius from wall x 14" tall

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Arm swings L/R
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Swing Arm Sconce - 17" Arm

SKU: 40121-17




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

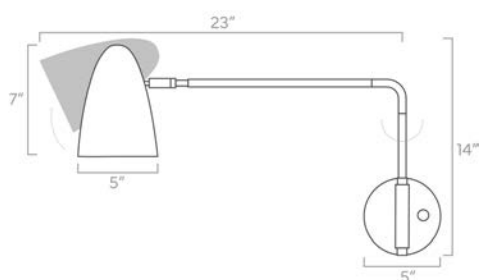

Dimensions

23" radius from wall x 14" tall

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Arm swings L/R
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Cadbury Sconce 8"

SKU: 50120-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

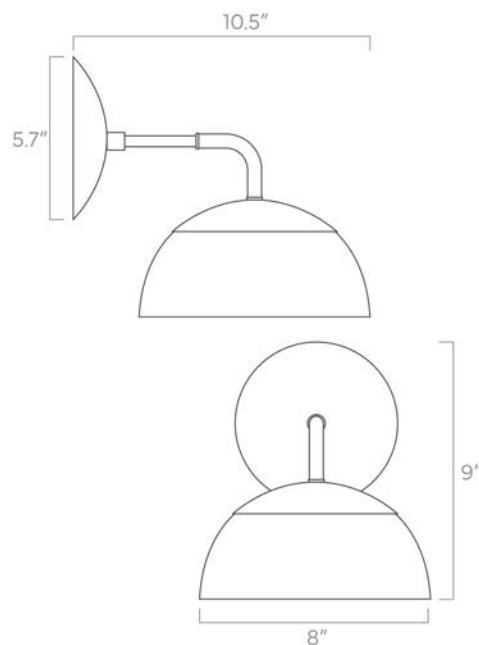

Dimensions

9" x 8" x 10.5"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cadbury Sconce 10"

SKU: 50120-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

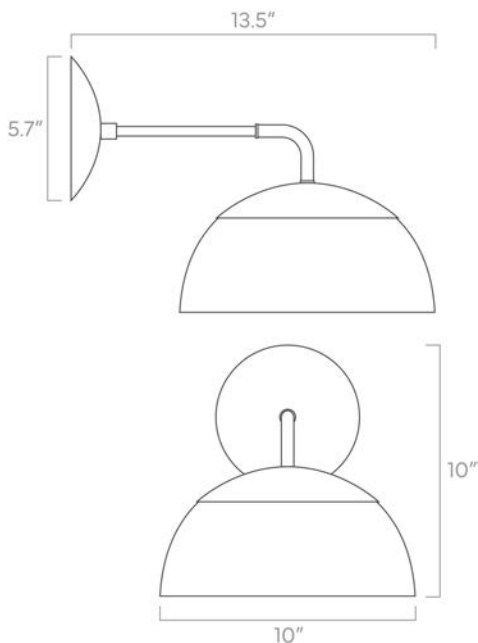

Dimensions

10" x 10" x 13.5"

Weight

3 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Sconce 8"

SKU: 50121-8





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

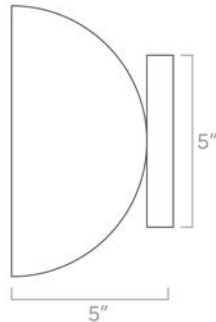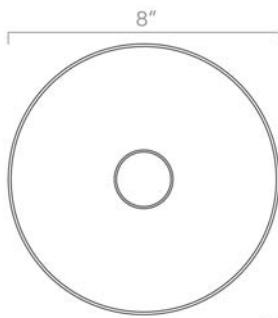

Dimensions

8" x 8" x 5"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Sconce 10"

SKU: 50121-10





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

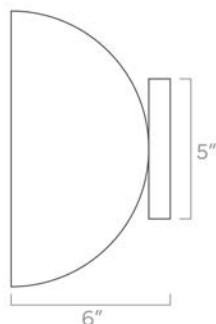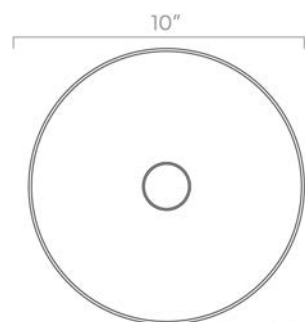

Dimensions

10" x 10" x 6"

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Amigo Sconce

SKU: 50220




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

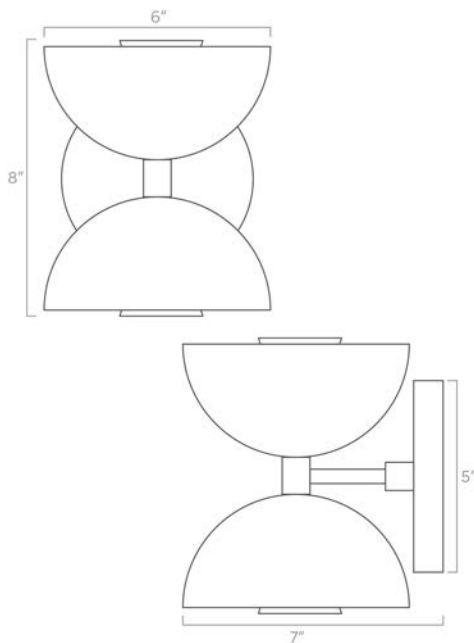

Dimensions

8" x 6" x 7"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Beso Sconce

SKU: 50221





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | Black |

duttonbrown.com/finishes

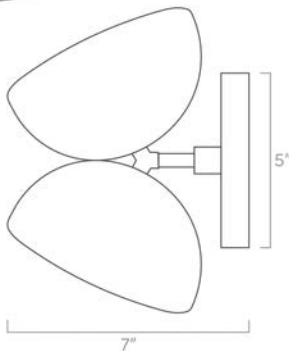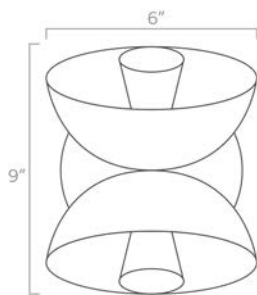

Dimensions

9" x 6" x 7"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Snug Sconce

SKU: 60121




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

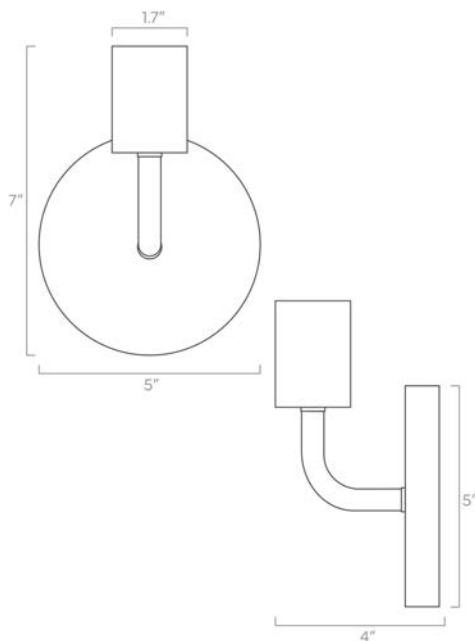

Dimensions

7" x 5" x 4"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Tall Snug Sconce

SKU: 60123




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

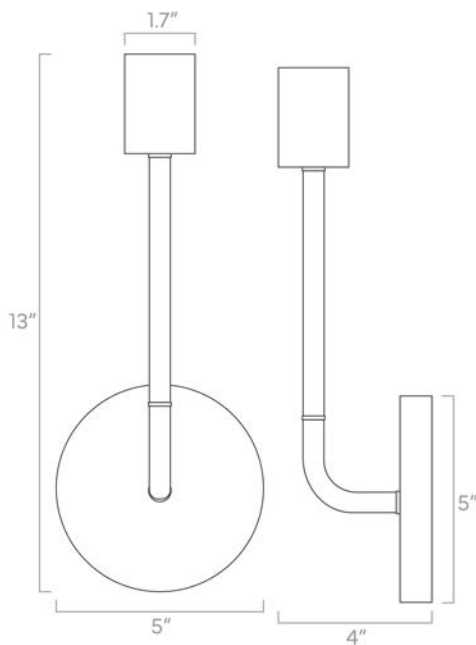

Dimensions

13" x 5" x 4"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Sconce - No Arm

SKU: 60124-0




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

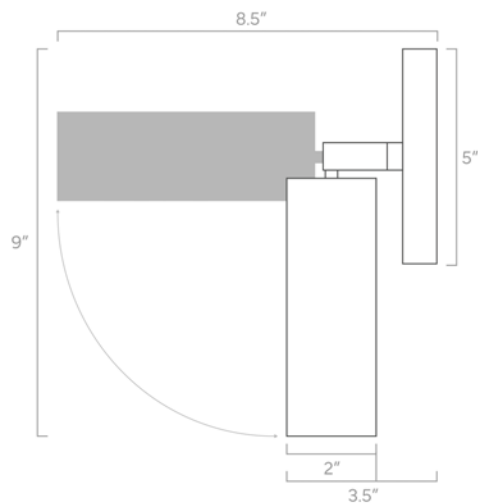

Dimensions

9" x 5" x 8.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Sconce - 3" Arm

SKU: 60124-3




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

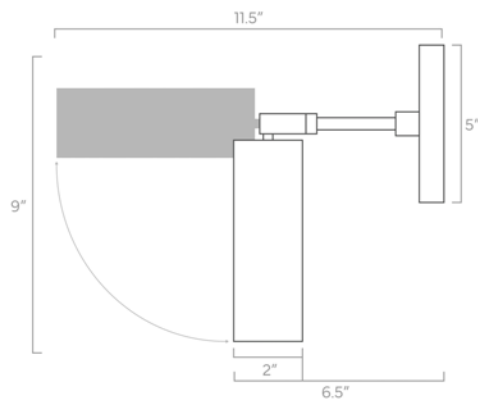

Dimensions

9" x 5" x 11.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Sconce - 6" Arm

SKU: 60124-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

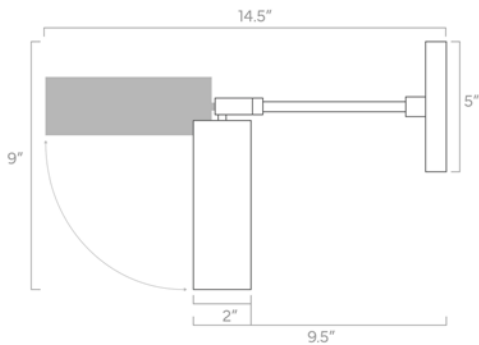

Dimensions

9" x 5" x 14.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Sconce - 10" Arm

SKU: 60124-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

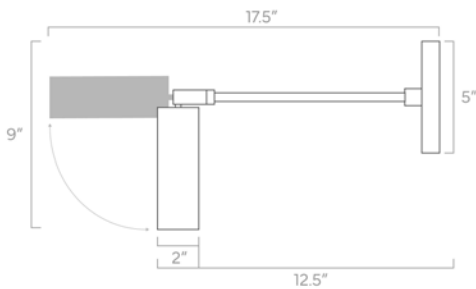

Dimensions

9" x 5" x 17.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada




Engage



duttonbrown.com/engage

Twink Sconce

SKU: 60125

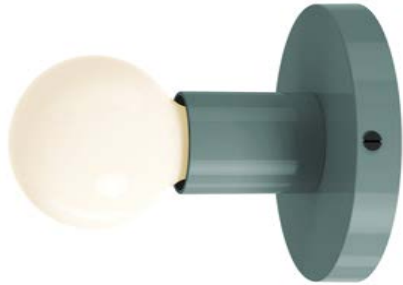


Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

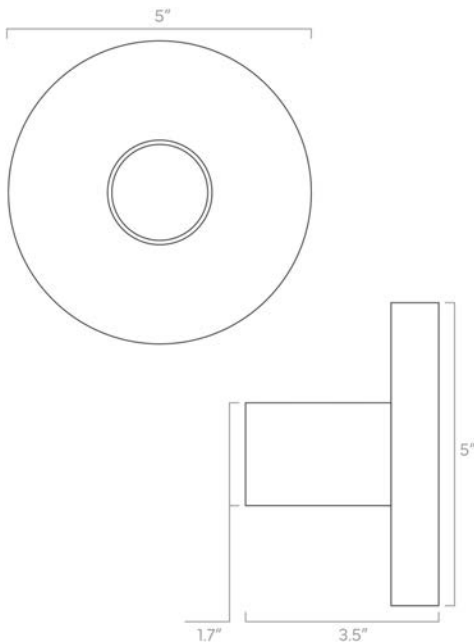

Dimensions

5" x 5" x 3.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Display Sconce

SKU: 60127




Finish Options

-  Brass
-  Nickel
-  Black

Color Options

- | | |
|--|---|
|  White |  Ochre |
|  Bone |  Orange |
|  Spa |  Riding Hood Red |
|  Python Green |  Barely |
|  Lagoon |  Chalk |
|  Cobalt |  Black |
|  Slate Blue | |

duttonbrown.com/finishes

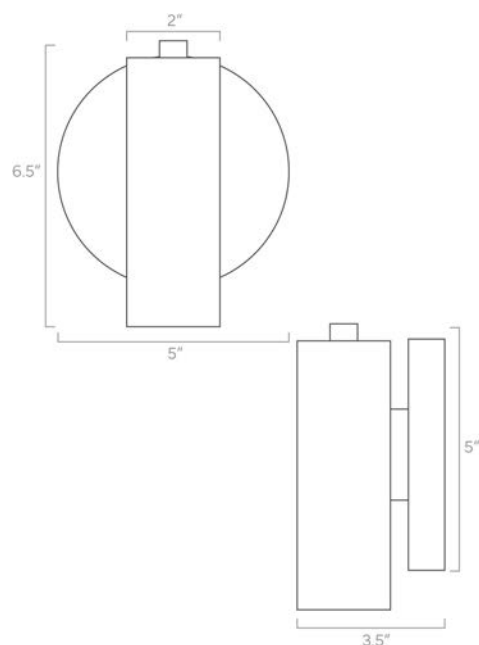

Dimensions

6.5" x 5" x 3.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Swing Arm Sconce - 9" Arm

SKU: 60128-9




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

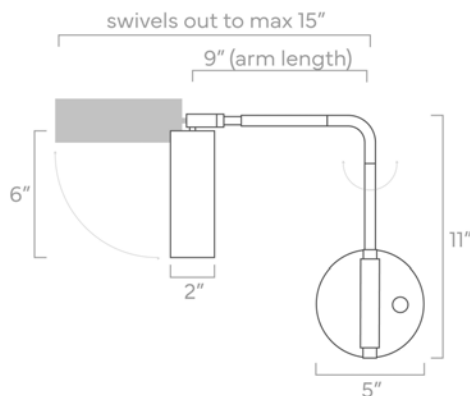

Dimensions

15" radius from wall x 11" tall

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Swing Arm Sconce - 17" Arm

SKU: 60128-17




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

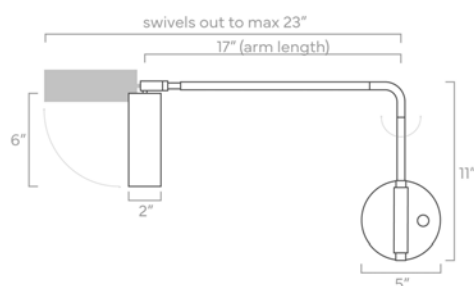

Dimensions

23" radius from wall x 11" tall

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Major Sconce 9"

SKU: 60129-9




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

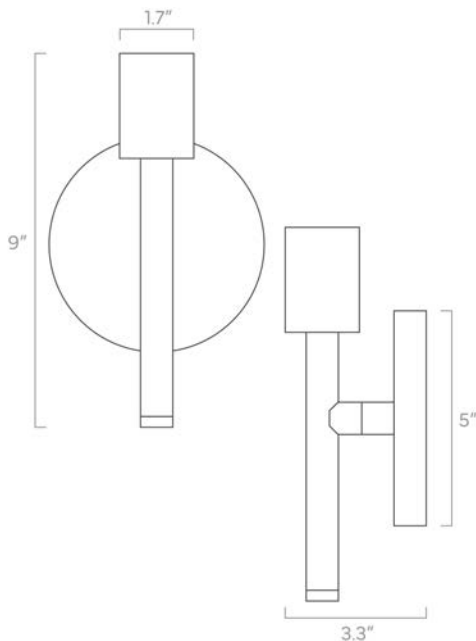

Dimensions

9" x 5" x 3.3"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Engage



duttonbrown.com/engage

Major Sconce 15"

SKU: 60129-15




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

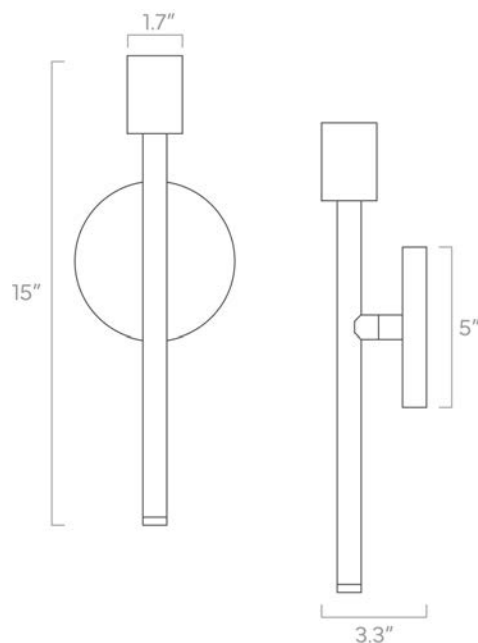

Dimensions

15" x 5" x 3.3"

Weight

1 lb

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Major Sconce 21"

SKU: 60129-21




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

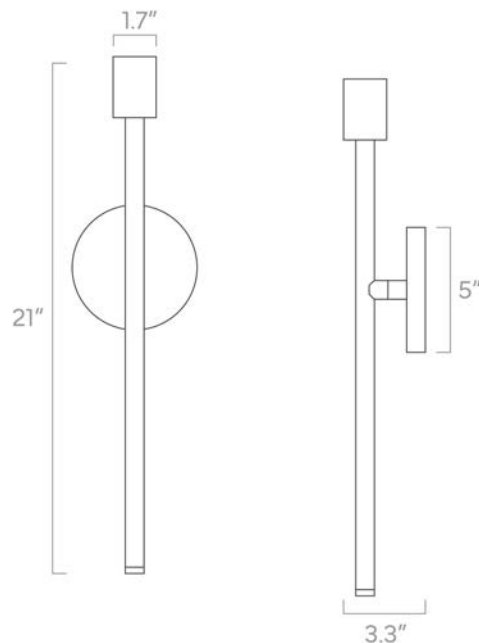

Dimensions

21" x 5" x 3.3"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Engage



duttonbrown.com/engage

Scepter Sconce 10"

SKU: 60220




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

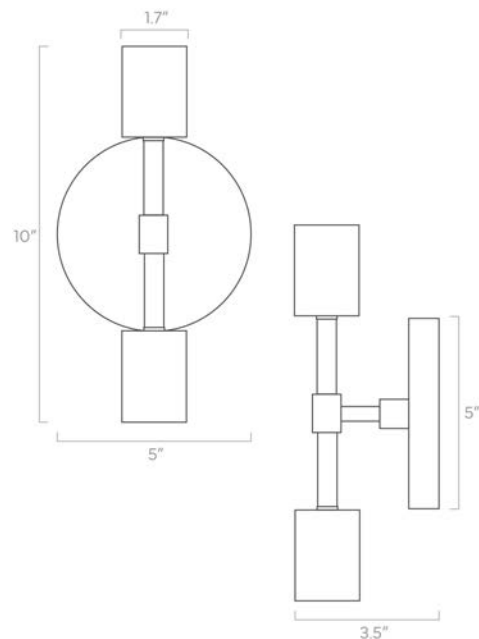

Dimensions

10" x 5" x 3.5"

Weight

1 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Scepter Sconce 18"

SKU: 60221




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

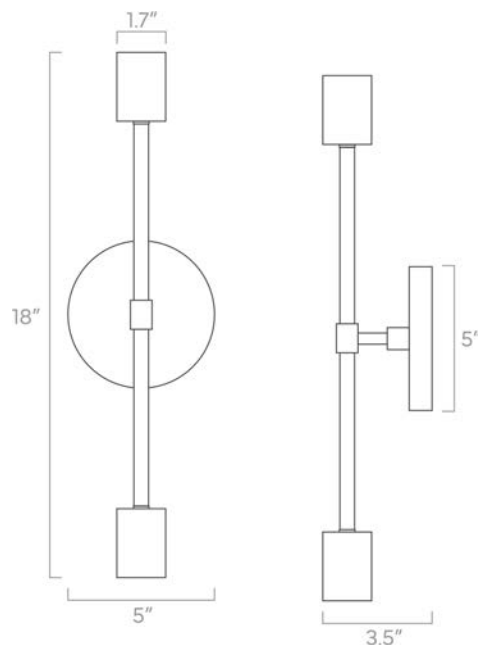

Dimensions

18" x 5" x 3.5"

Weight

1 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Monarch Sconce

SKU: 60222




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

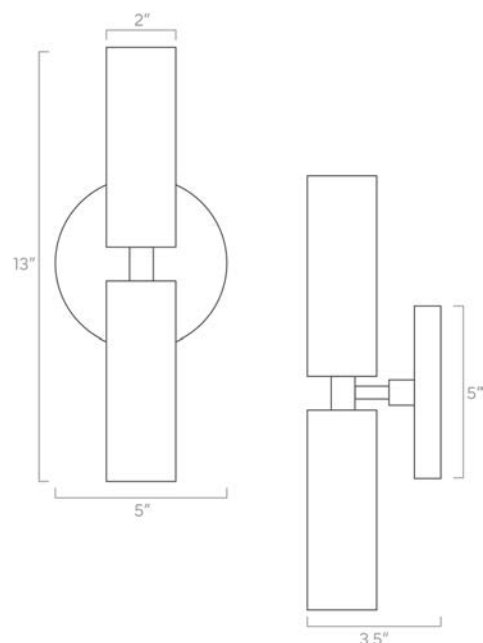

Dimensions

13" x 5" x 3.5"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Ruler Sconce

SKU: 60224




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

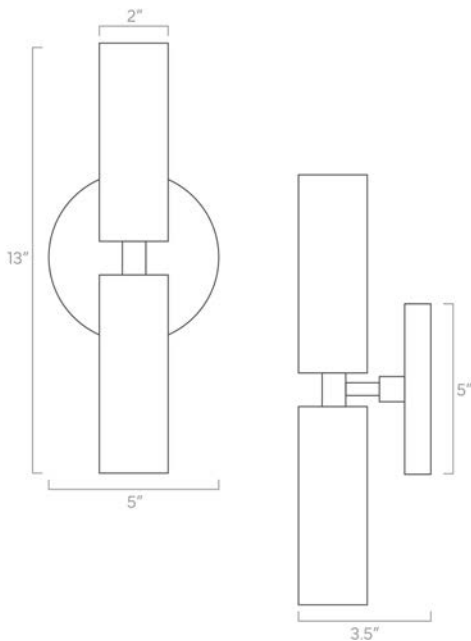

Dimensions

13" x 5" x 3.5"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
 - 120V, MAX 7W per socket
 - (2) LED PAR16 bulbs included.
- 4.5W, 450 lm, 3000K.

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Pilot Sconce 11"

SKU: 60226-11




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

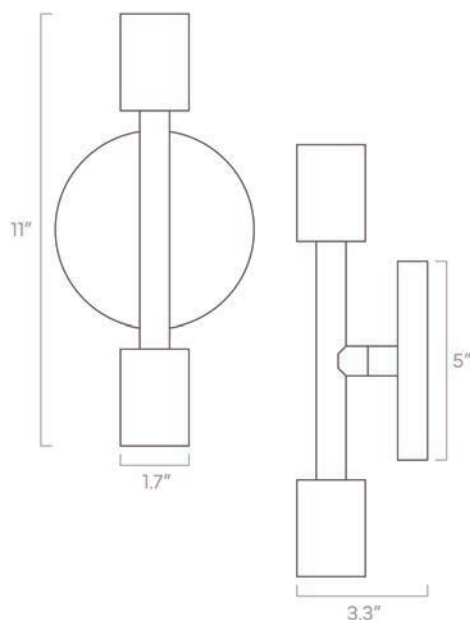

Dimensions

11" x 5" x 3.3"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Engage



duttonbrown.com/engage

Pilot Sconce 17"

SKU: 60226-17




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

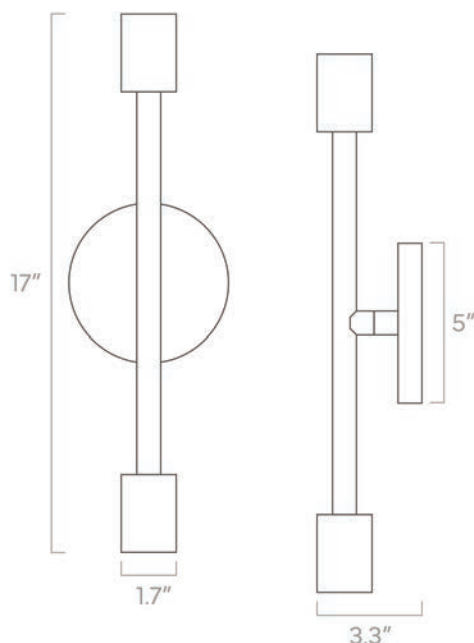

Dimensions

17" x 5" x 3.3"

Weight

1 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Pilot Sconce 23"

SKU: 60226-23




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

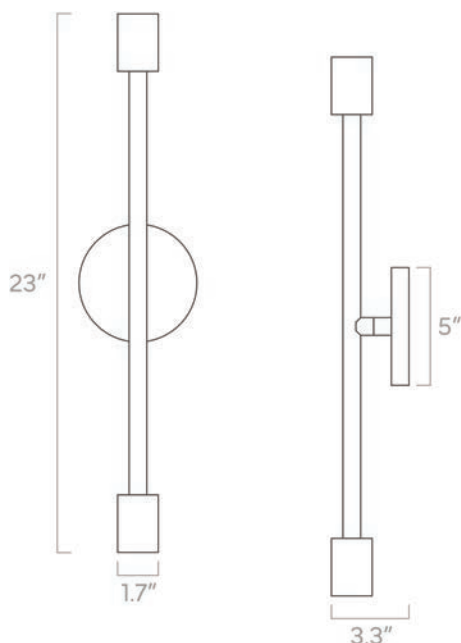

Dimensions

23" x 5" x 3.3"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Pilot Sconce 29"

SKU: 60226-29




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

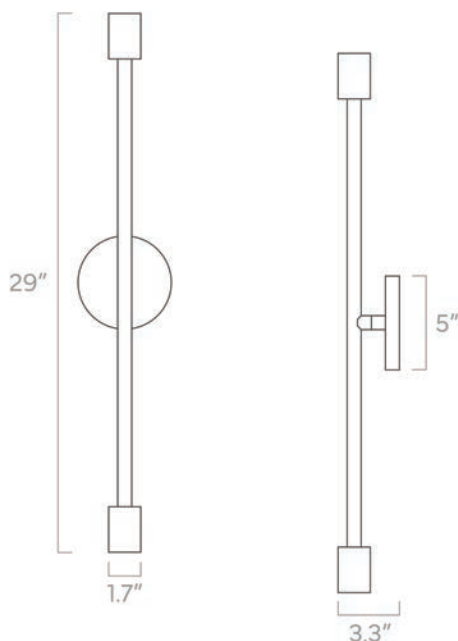

Dimensions

29" x 5" x 3.3"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Vogue 4 Sconce

SKU: 60420



Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black


duttonbrown.com/finishes

Dimensions

18" x 5" x 4.5"

Weight

3 lb

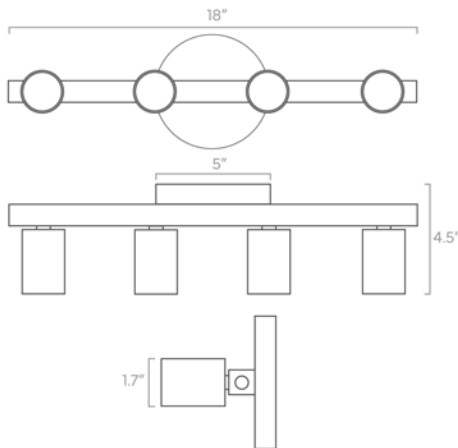

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Vogue 7 Sconce

SKU: 60720



Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

Dimensions


30" x 5" x 4.5"

Weight

4 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

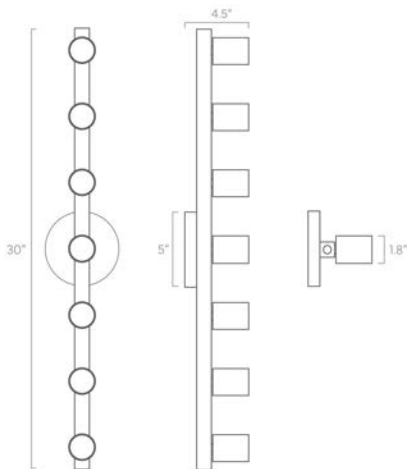

Rating

- (7) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lepore Sconce


SKU: 70122



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

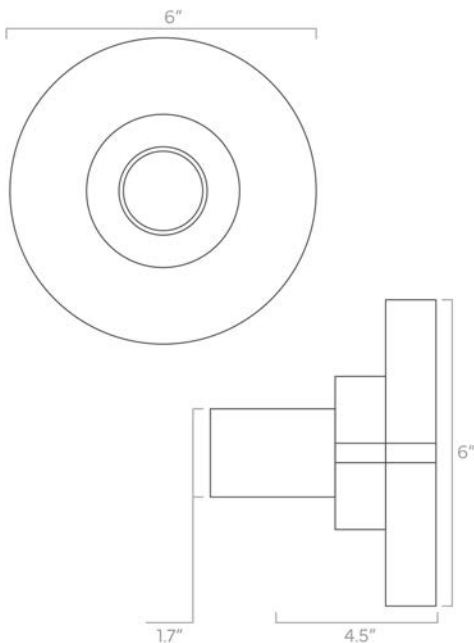

Dimensions

6" x 6" x 4.5"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Acrylic
- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Bianca Sconce 12"

SKU: 70220




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

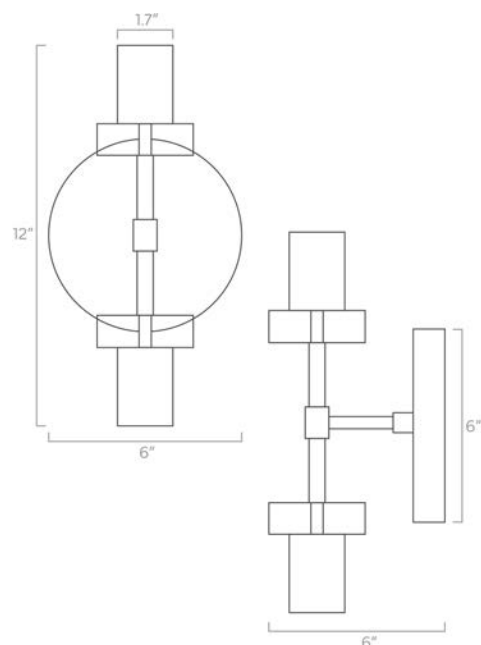

Dimensions

12" x 6" x 6"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Acrylic
- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Phoenix Sconce

SKU: 70221




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

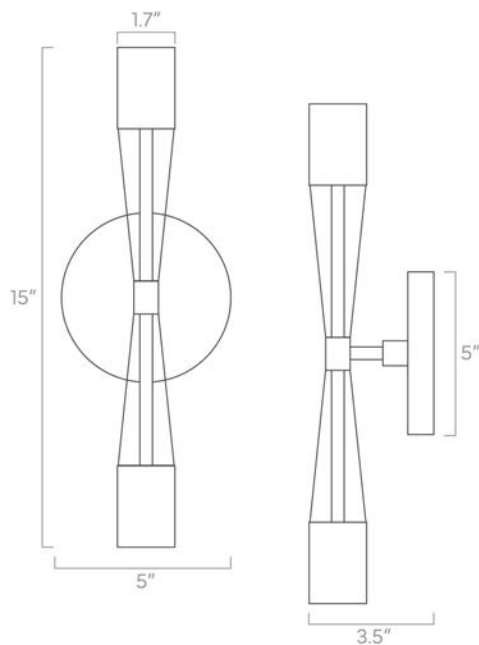

Dimensions

15" x 5" x 3.5"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Acrylic
- Aluminum
- Brass

Engage



duttonbrown.com/engage

Bianca Sconce 20"

SKU: 70222




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

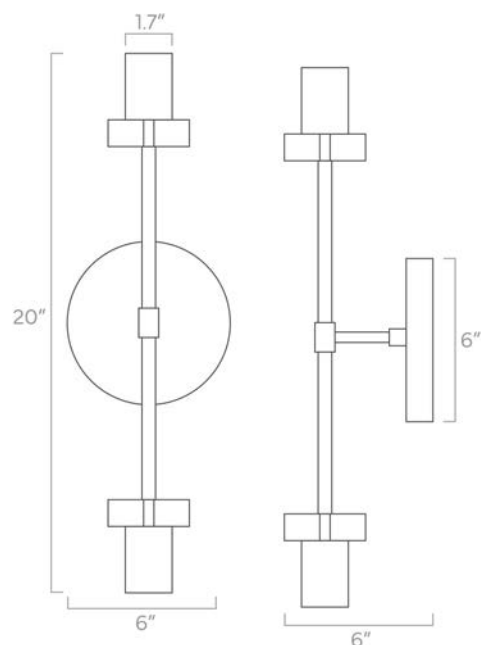

Dimensions

20" x 6" x 6"

Weight

3 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Acrylic
- Aluminum
- Brass

Engage



duttonbrown.com/engage

Urchin Flush Mount 20"

SKU: 10401F-20




Finish Options

 Brass



duttonbrown.com/finishes

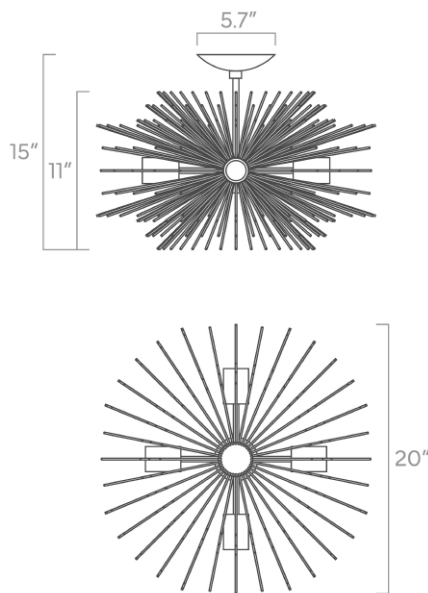

Dimensions

20" x 20" x 11"

Weight

10 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Urchin Flush Mount 27"

SKU: 10401F-27




Finish Options

 Brass



duttonbrown.com/finishes

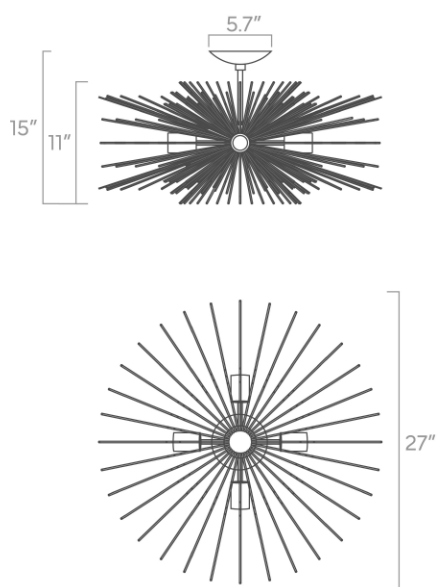

Dimensions

27" x 27" x 11"

Weight

11 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Beaded Urchin Flush Mount 20"

SKU: 10401F-20





Finish Options

 Brass

Color Options

 White	 Ochre
 Bone	 Orange
 Spa	 Riding Hood Red
 Python Green	 Barely
 Lagoon	 Chalk
 Cobalt	 Black
 Slate Blue	 Black

duttonbrown.com/finishes

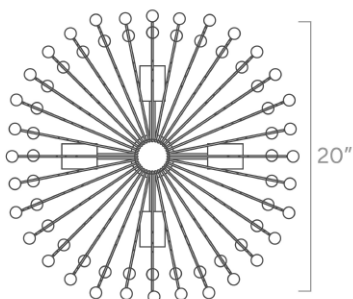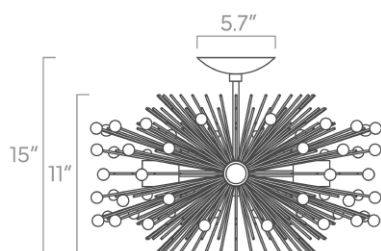

Dimensions

20" x 20" x 11"

Weight

12 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass


Engage



duttonbrown.com/engage

Beaded Urchin Flush Mount 27"

SKU: 10403F-27

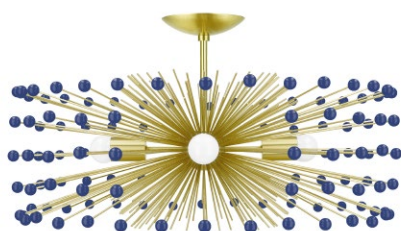



Finish Options

Brass

Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

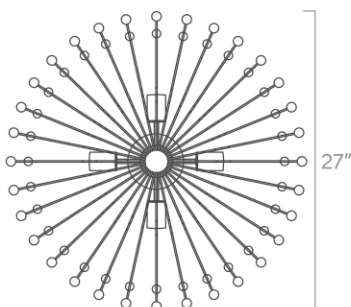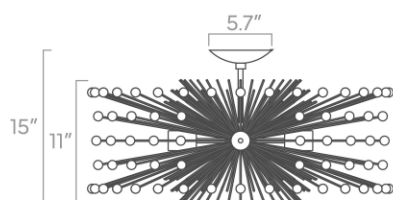

Dimensions

27" x 27" x 11"

Weight

14 lb

Installed Height

15"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Sputnik Flush Mount

SKU: 20630





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

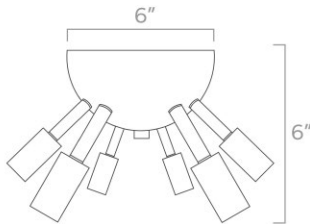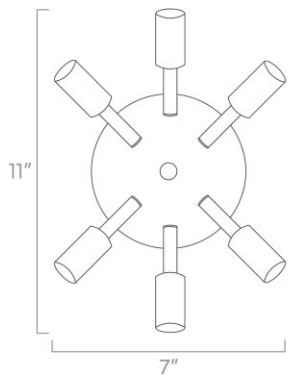

Dimensions

11" x 7" x 6"

Weight

2 lb

Installed Height

6"

Rating

- (6) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)

Certifications

- UL listed for dry locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Elliptical Sputnik Flush Mount

SKU: 21800F




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

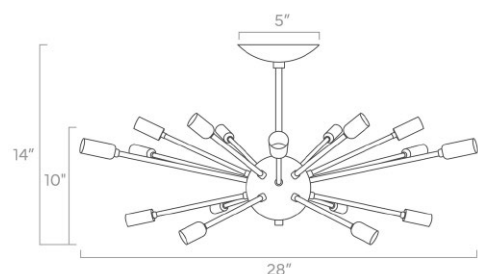

Dimensions

28" x 28" x 10"

Weight

5 lb

Installed Height

14"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Rating

- (18) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 6"

SKU: 30112F-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

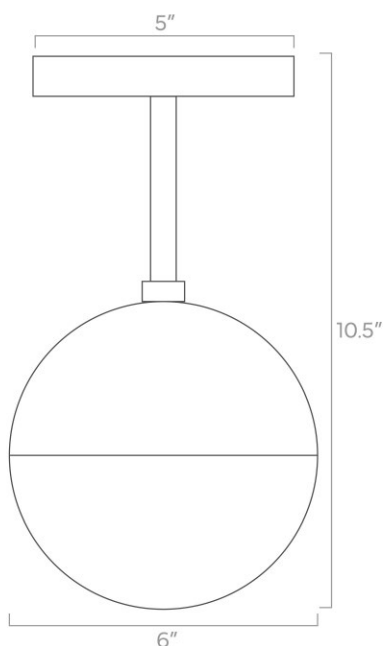

Dimensions

10.5" x Ø6"

Weight

2 lb

Installed Height

10.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 8"

SKU: 30112F-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

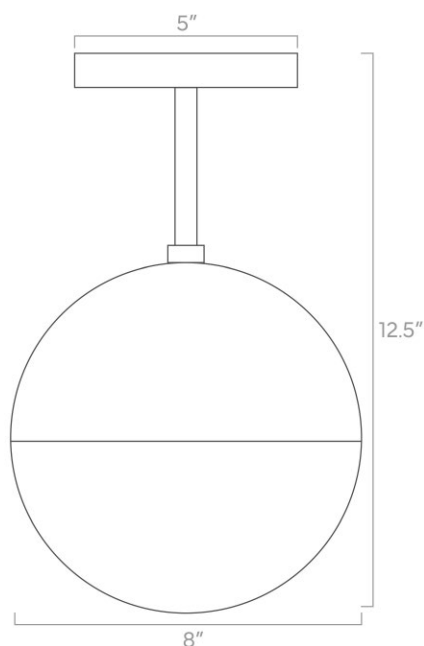

Dimensions

12.5" x Ø8"

Weight

3 lb

Installed Height

12.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 10"

SKU: 30112F-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

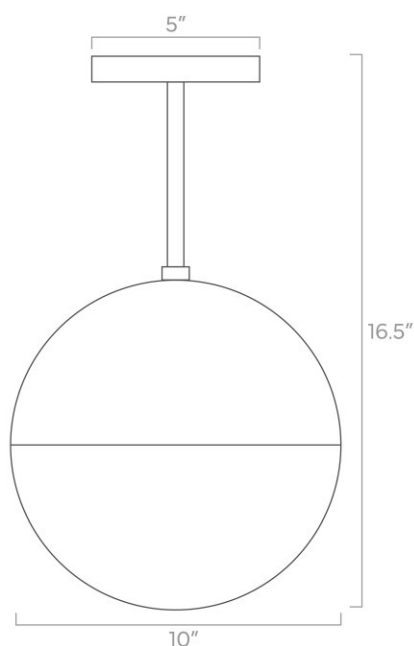

Dimensions

16.5" x Ø10"

Weight

4 lb

Installed Height

16.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lure Flush Mount 12"

SKU: 30112F-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

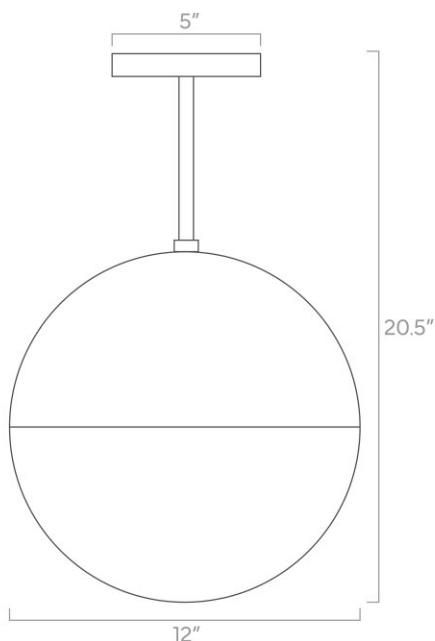

Dimensions

20.5" x Ø12"

Weight

5 lb

Installed Height

20.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 6"

SKU: 30130-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

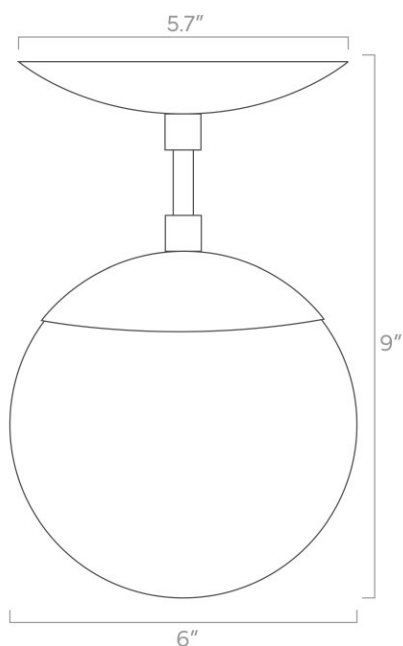

Dimensions

9" x Ø6"

Weight

1 lb

Installed Height

9"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 8"

SKU: 30130-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

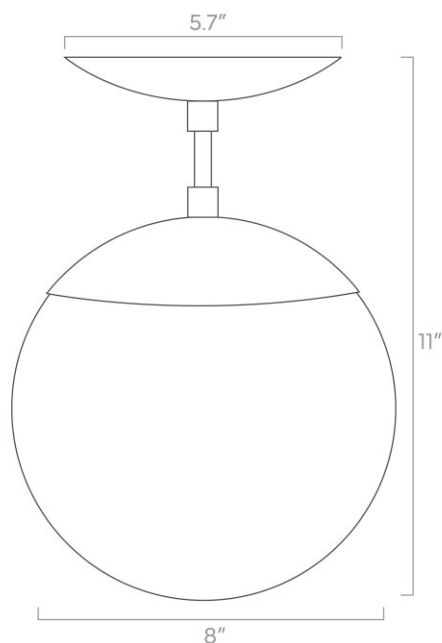

Dimensions

11" x Ø8"

Weight

2 lb

Installed Height

11"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 10"

SKU: 30130-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

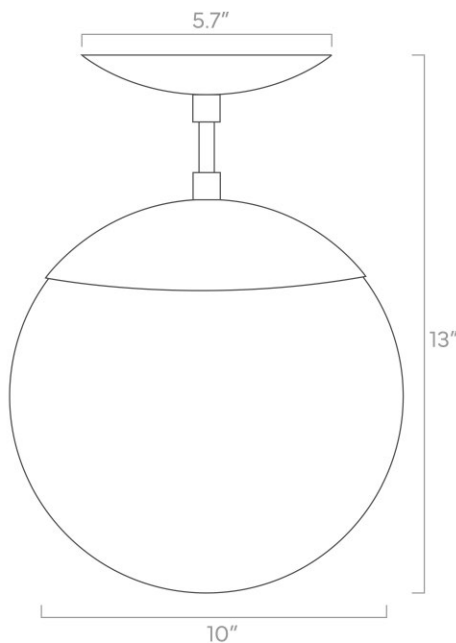

Dimensions

13" x Ø10"

Weight

3 lb

Installed Height

13"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Flush Mount 12"

SKU: 30130-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

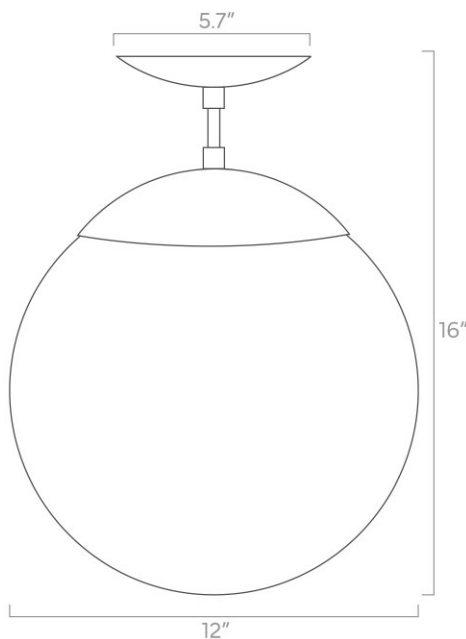

Dimensions

16" x Ø12"

Weight

4 lb

Installed Height

16"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Icon 2 Flush Mount

SKU: 30230




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

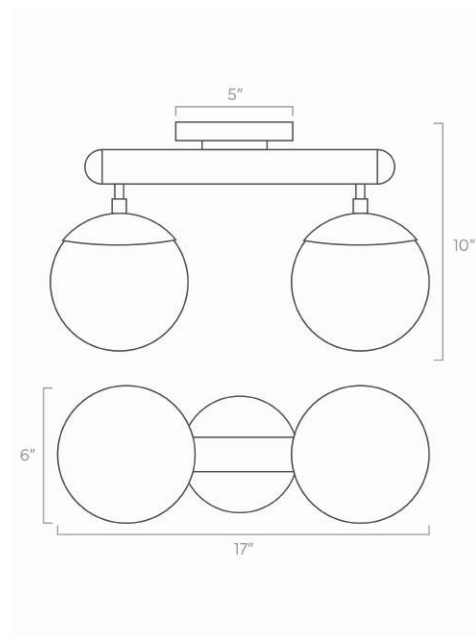

Dimensions

17" x 10" x 6"

Weight

4 lb

Installed Height

10"

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Ballsy Flush Mount

SKU: 30330





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

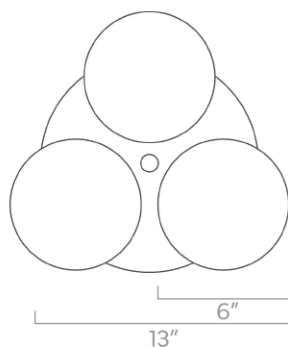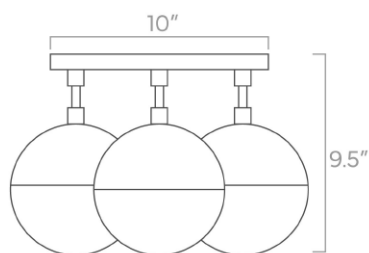

Dimensions

13" x 13" x 9.5", Globe: 6"

Weight

6 lb

Installed Height

9.5"

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Supreme Flush Mount

SKU: 30332





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

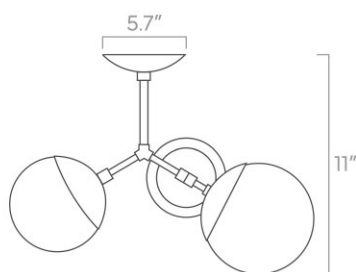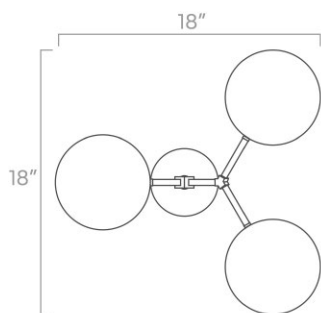

Dimensions

18" x 18" x 11"

Weight

4 lb

Installed Height

11"

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Icon 3 Flush Mount

SKU: 30333




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

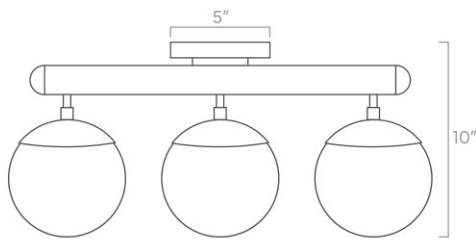

Dimensions

23" x 10" x 6"

Weight

5 lb

Installed Height

10"

Configuration


- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Aluminum
- Brass
- Opal glass

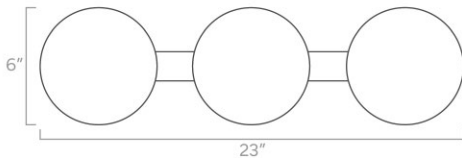

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Orbi Flush Mount

SKU: 30402F





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

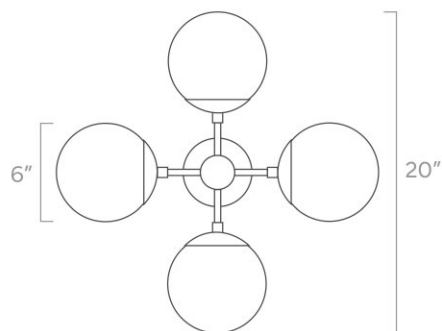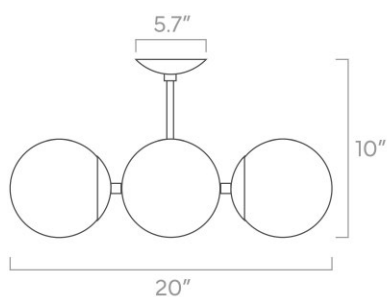

Dimensions

20" x 20" x 6"

Weight

7 lb

Installed Height

10"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Big Orbi Flush Mount

SKU: 30403F





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

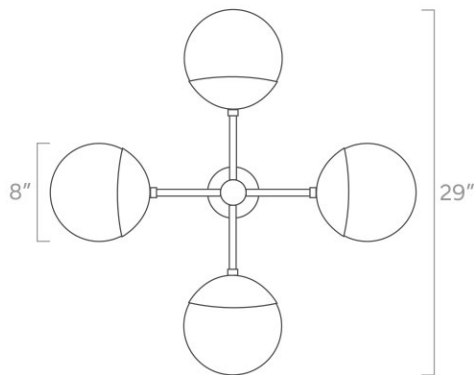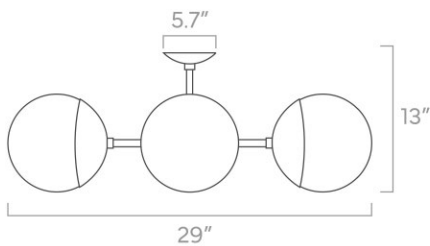

Dimensions

29" x 29" x 8"

Weight

10 lb

Installed Height

13"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Opal glass

Engage



duttonbrown.com/engage

Tetra Flush Mount

SKU: 30404F





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

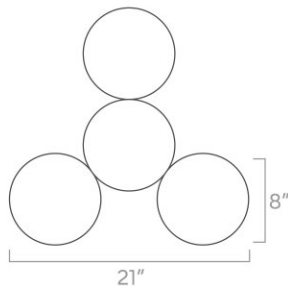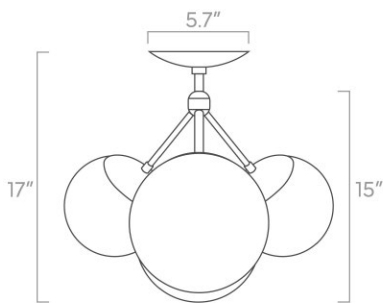

Dimensions

21" x 21" x 15"

Weight

9 lb

Installed Height

17"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Brass
- Opal glass

Engage



duttonbrown.com/engage

Status Flush Mount

SKU: 30405F




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

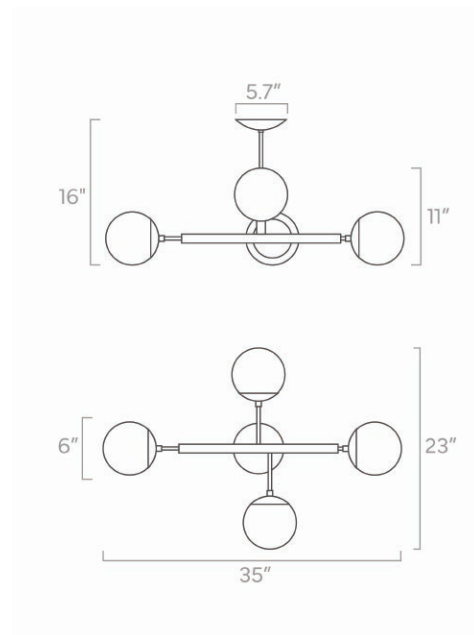

Dimensions

35" x 23" x 11"

Weight

7 lb

Installed Height

16"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Glass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Big Status Flush Mount

SKU: 30407F




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

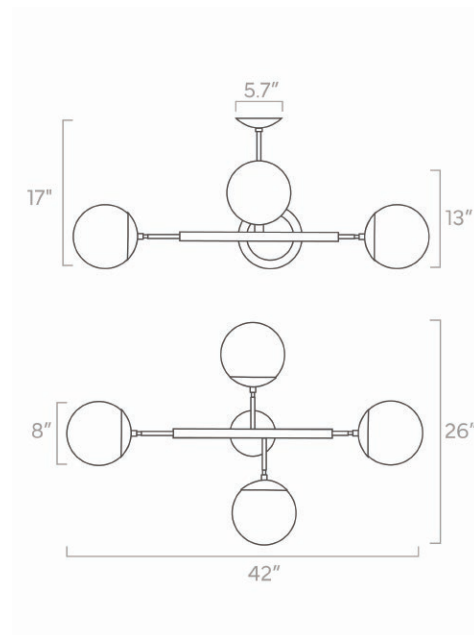

Dimensions

42" x 26" x 13"

Weight

12 lb

Installed Height

17"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Crown Flush Mount 32"

SKU: 31000F




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

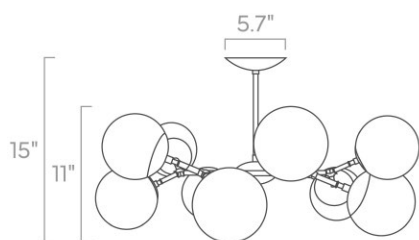

Dimensions

32" x 32" x 11"

Weight


16 lb

Installed Height

15"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

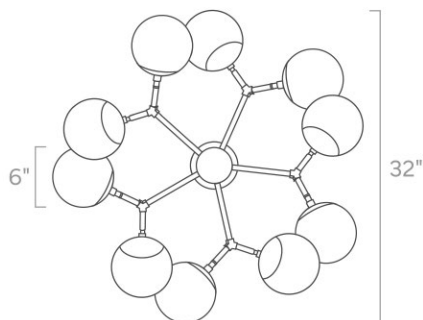

Rating

- (10) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Brass
- Opal glass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Crown Flush Mount 46"

SKU: 31000F





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

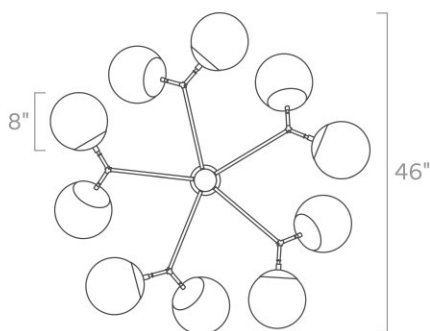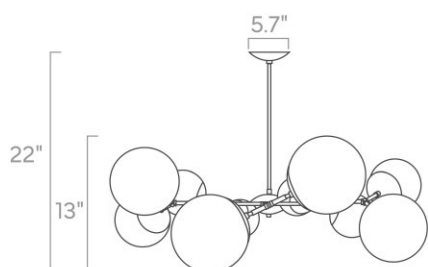

Dimensions

46" x 46" x 13"

Weight

20 lb

Installed Height

22"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Brass
- Opal glass


Engage



duttonbrown.com/engage

Maxo Flush Mount 8"

SKU: 40131-8

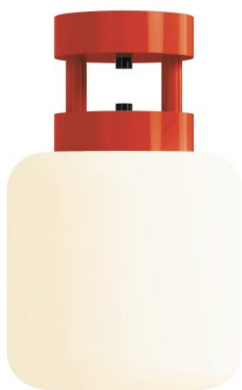


Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

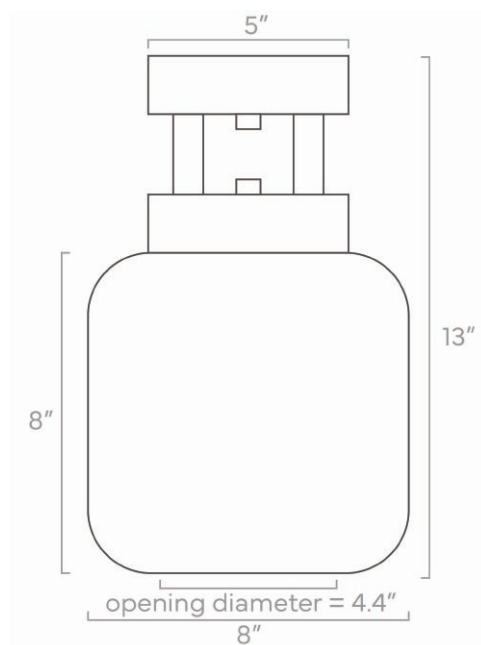

Dimensions

13" x Ø8"

Weight

3 lb

Installed Height

13"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Maxo Flush Mount 13"

SKU: 40131-13




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

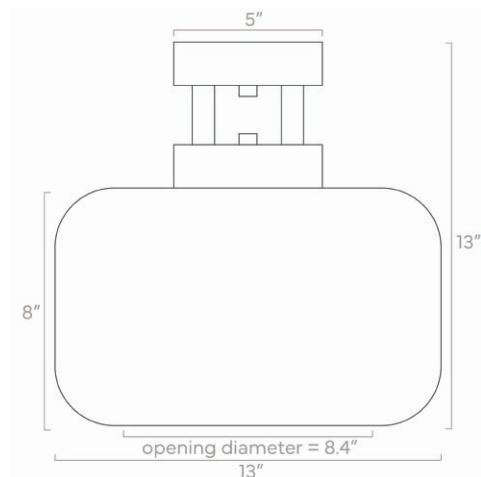

Dimensions

13" x Ø13"

Weight

4 lb

Installed Height

13"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cadbury Flush Mount 8"

SKU: 50130-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

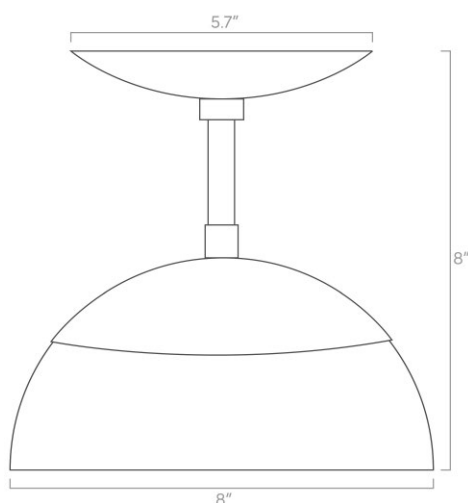

Dimensions

8" x Ø8"

Weight

2 lb

Installed Height

8"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Cadbury Flush Mount 10"

SKU: 50130-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

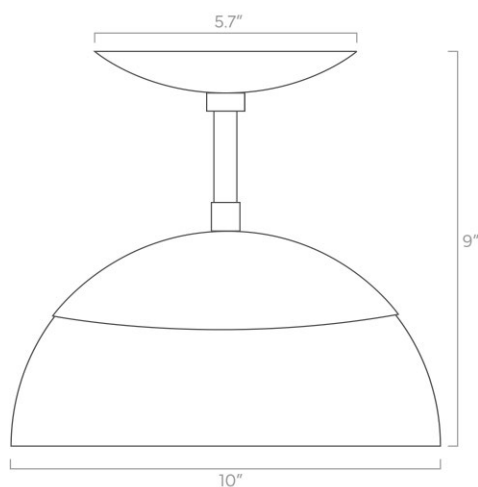

Dimensions

9" x Ø10"

Weight

3 lb

Installed Height

9"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cadbury Flush Mount 12"

SKU: 50130-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

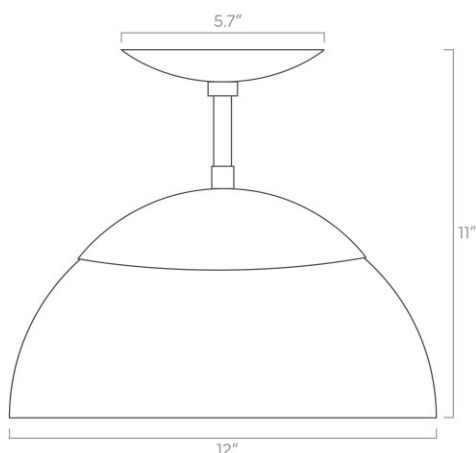

Dimensions

11" x Ø12"

Weight

4 lb

Installed Height

11"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Flush Mount 8"

SKU: 50131-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

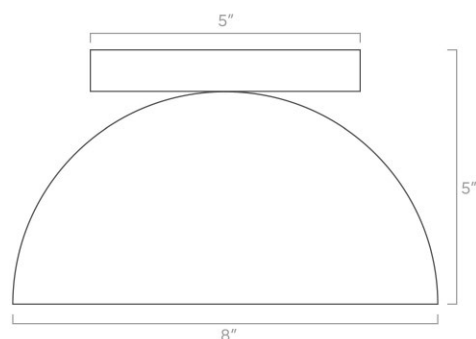

Dimensions

5" x Ø8"

Weight

2 lb

Installed Height

5"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Flush Mount 10"

SKU: 50131-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

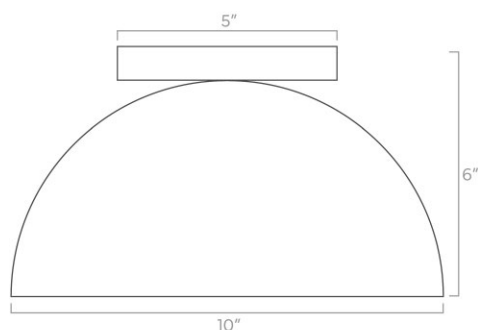

Dimensions

6" x Ø10"

Weight

3 lb

Installed Height

6"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Flush Mount 12"

SKU: 50131-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

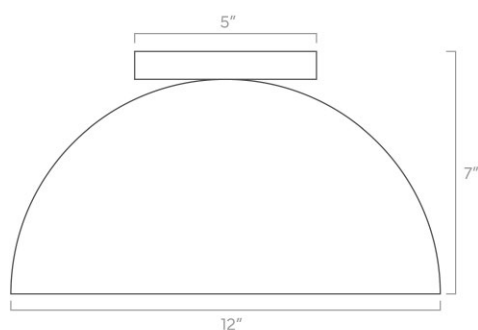

Dimensions

7" x Ø12"

Weight

4 lb

Installed Height

7"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Alegria Flush Mount

SKU: 51000F





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

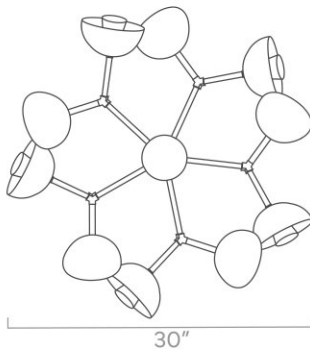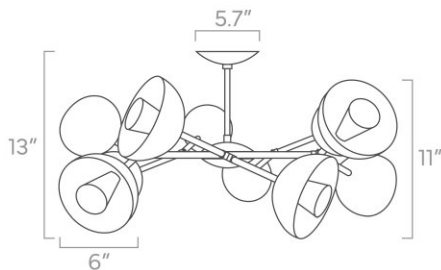

Dimensions

30" x 30" x 11"

Weight

12 lb

Installed Height

13"

Rating

- (10) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass


Engage



duttonbrown.com/engage

Reader Flush Mount

SKU: 60130

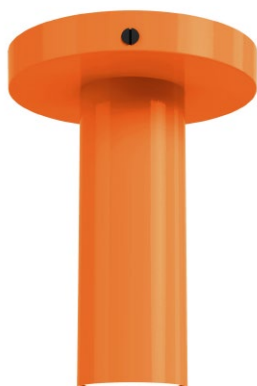


Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

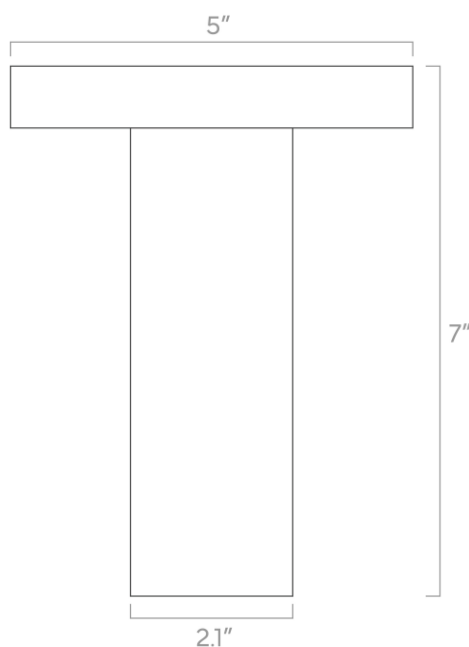

Dimensions

7" x Ø5"

Weight

1 lb

Installed Height

7"

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant and sconce

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Eureka Flush Mount

SKU: 60131




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

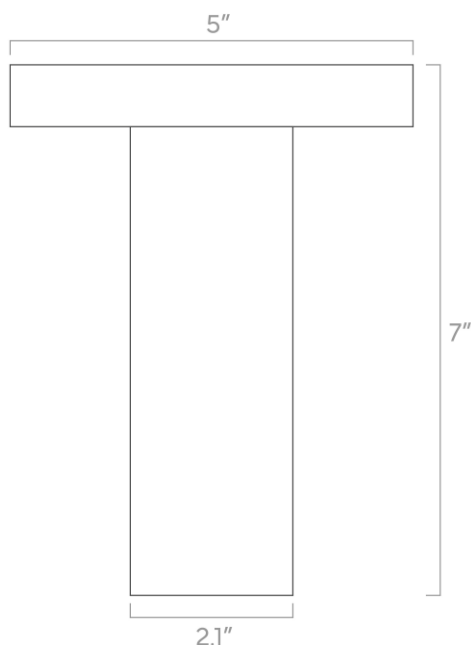

Dimensions

7" x Ø5"

Weight

1 lb

Installed Height

7"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Twink Flush Mount

SKU: 60132




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

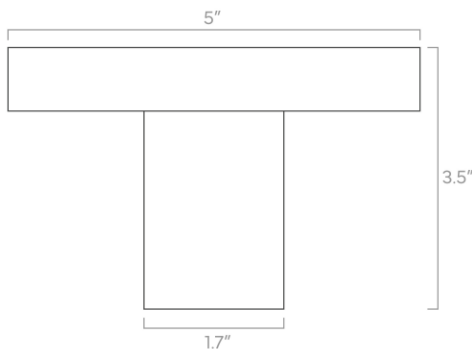

Dimensions

3.5" x Ø5"

Weight

1 lb

Installed Height

3.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling
- Available as pendant

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Pilot Flush Mount 29"

SKU: 60230




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

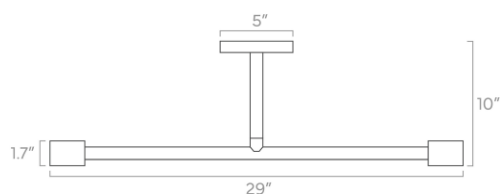

Dimensions

29" x 1.7" x 1.7"

Weight

2 lb

Installed Height

10"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant and sconce

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Pilot Flush Mount 47"

SKU: 60231




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

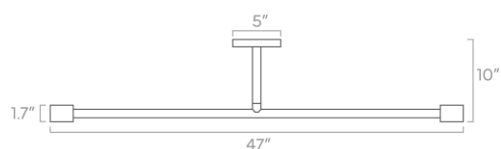

Dimensions

47" x 1.7" x 1.7"

Weight

3 lb

Installed Height

10"

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant and sconce

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Pose Flush Mount

SKU: 60330





Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

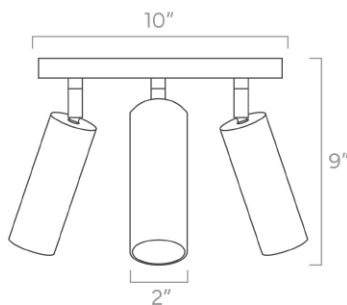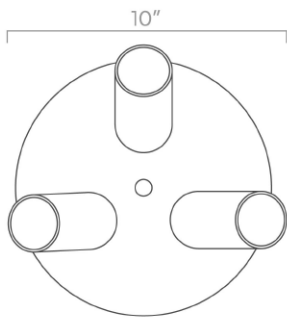

Dimensions

10" x 10" x 9", Lamp Cup: 6" x 2"

Weight

5 lb

Installed Height

9"

Rating

- (3) Medium base E26 sockets
 - 120V, MAX 7W per socket
 - (3) LED PAR16 bulbs included.
- 4.5W, 450 lm, 3000K.

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Contains 3 repositionable arms which swivel up to 90° and rotate up to 330° stopping in center.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Captain Flush Mount 29"



SKU: 60430



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

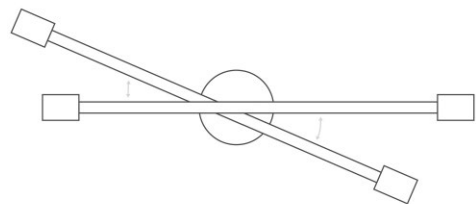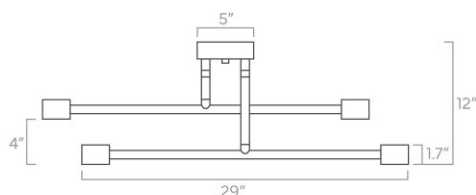

Dimensions

29" x 1.7" x 1.7" (2 rotatable tiers)

Weight

6 lb

Installed Height

12"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Engage



duttonbrown.com/engage

Captain Flush Mount 47"



SKU: 60431



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

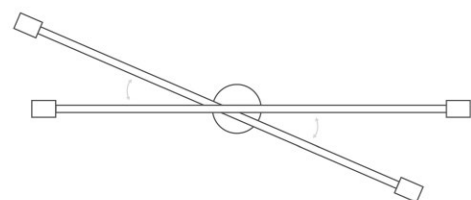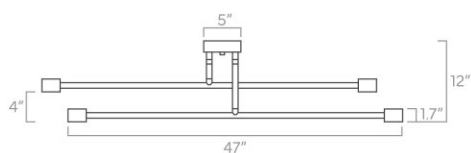

Dimensions

47" x 1.7" x 1.7" (2 rotatable tiers)

Weight

7 lb

Installed Height

12"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Vogue 4 Flush Mount


SKU: 60432



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

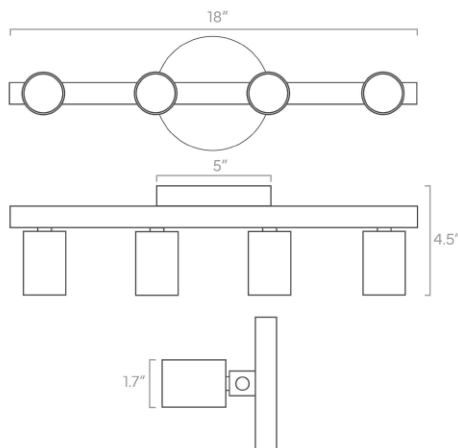

Dimensions

18" x 5" x 4.5"

Weight

3 lb

Installed Height

4.5"

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Commander Flush Mount 29"



SKU: 60630



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

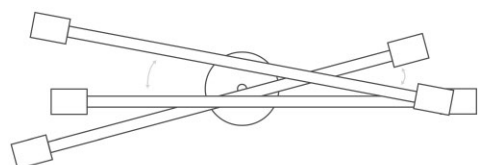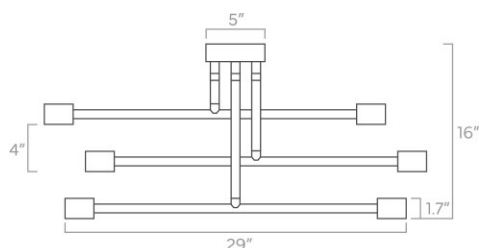

Dimensions

29" x 1.7" x 1.7" (3 rotatable tiers)

Weight

8 lb

Installed Height

16"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Commander Flush Mount 47"


SKU: 60631



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

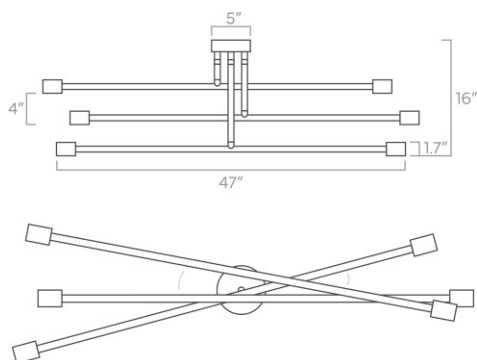

Dimensions

47" x 1.7" x 1.7" (3 rotatable tiers)

Weight

10 lb

Installed Height

16"

Rating

- (6) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada. Damp location by request.



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as chandelier with additional extension rods

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Vogue 7 Flush Mount


SKU: 60730



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

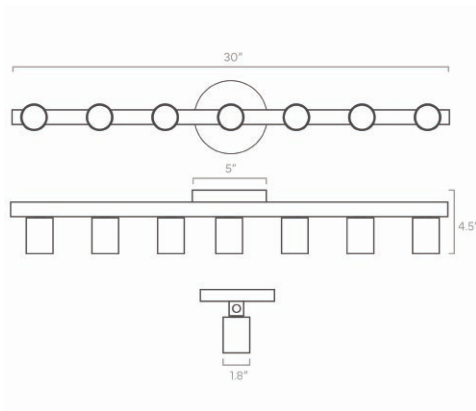

Dimensions

30" x 5" x 4.5"

Weight

4 lb

Installed Height

4.5"

Rating

- (7) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Bling Flush Mount

SKU: 70110F




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

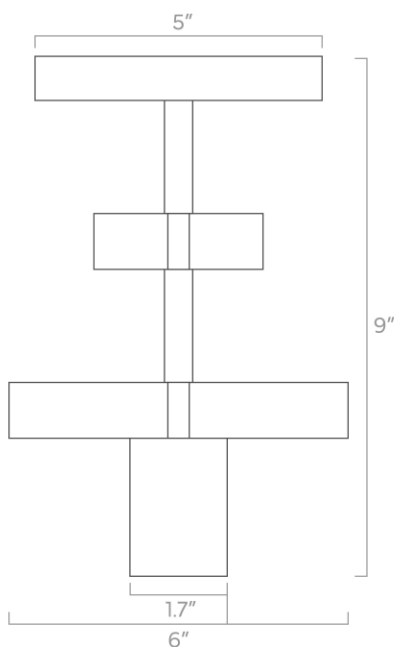

Dimensions

9" x Ø6"

Weight

1 lb

Installed Height

9"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Available as pendant

Materials

- Acrylic
- Aluminum
- Brass

Engage



duttonbrown.com/engage

Lepore Flush Mount


SKU: 70130



Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

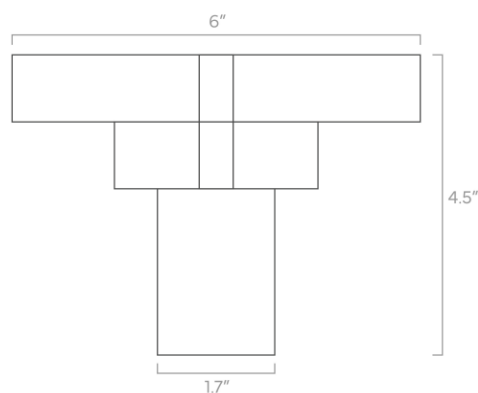

Dimensions

4.5" x Ø6"

Weight

1 lb

Installed Height

4.5"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for dry locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Materials

- Acrylic
- Aluminum
- Brass

Engage



duttonbrown.com/engage