

Sputnik Sconce

SKU: 20620





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

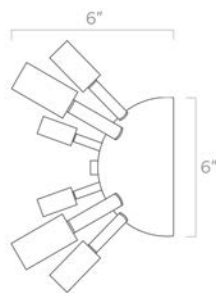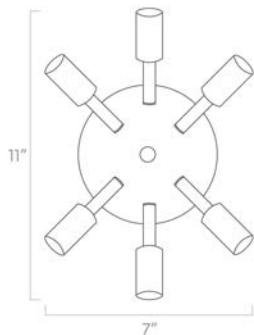

Dimensions

11" x 7" x 6"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Rating

- (6) Candelabra base E12 sockets
- 120V, MAX 25W per socket
- Recommend G16 candelabra bulbs (not included)

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Sconce 6"

SKU: 30120




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

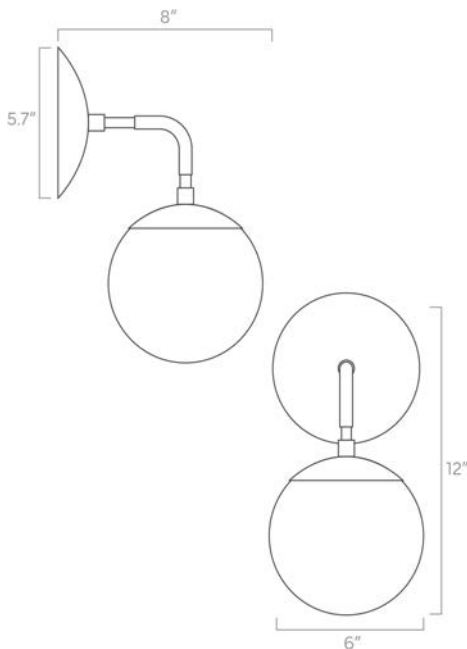

Dimensions

12" x 6" x 8"

Weight

1 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)
- Energy efficiency relabeling available by request

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Sconce 8"

SKU: 30121




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

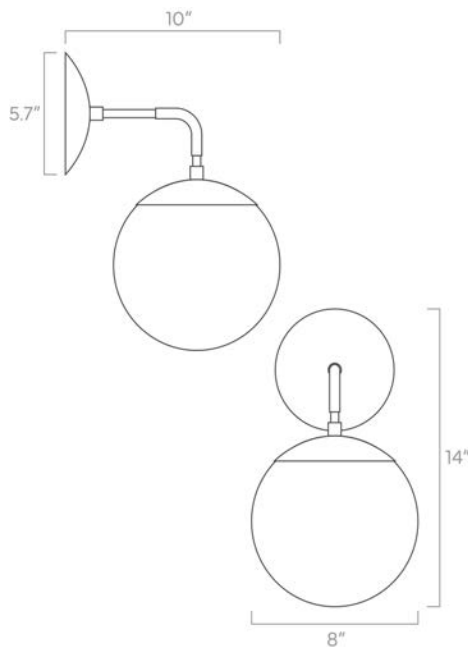

Dimensions

14" x 8" x 10"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Double Sconce 6"

SKU: 30220




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

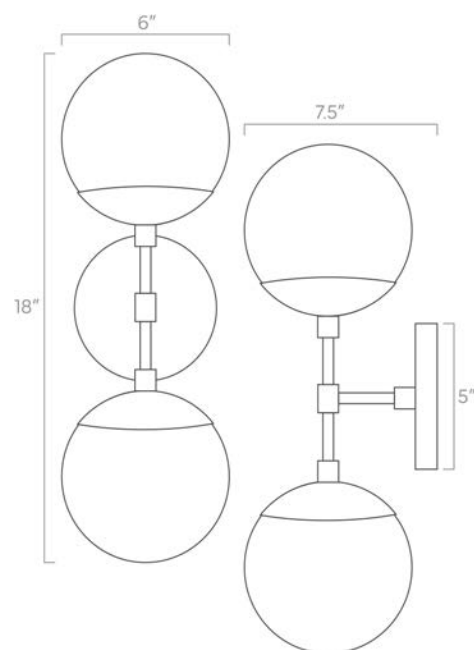

Dimensions

18" x 6" x 7.5"

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)
- Energy efficiency relabeling available by request

Materials

- Brass
- Glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cap Double Sconce 8"

SKU: 30221




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

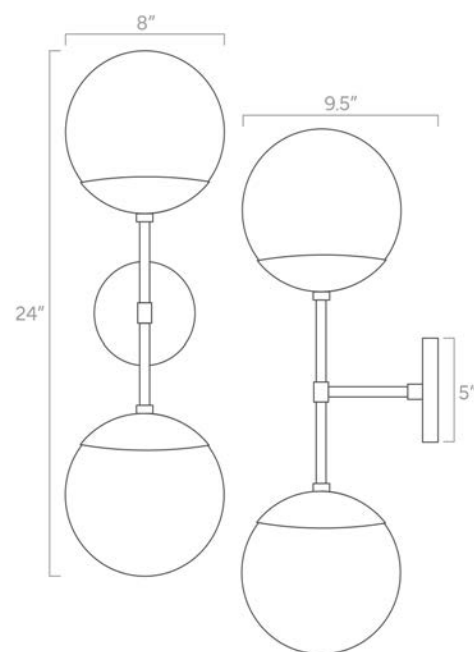

Dimensions

24" x 8" x 9.5"

Weight

4 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Brass
- Opal glass

Engage



duttonbrown.com/engage

Visage Sconce

SKU: 30222




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

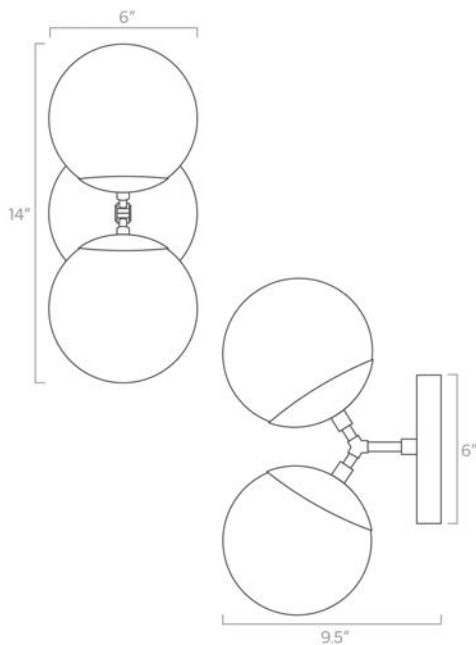

Dimensions

14" x 6" x 9.5"

Weight

4 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Acrylic
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Legend 2 Sconce

SKU: 30223





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

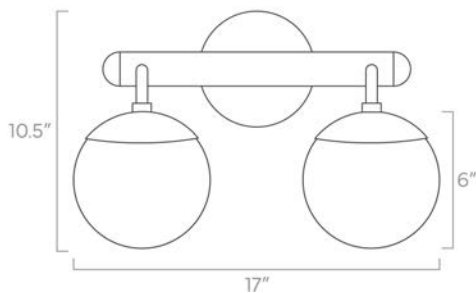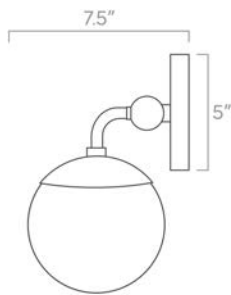

Dimensions

17" x 10.5" x 7.5"

Weight

4 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Icon 2 Sconce

SKU: 30224




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

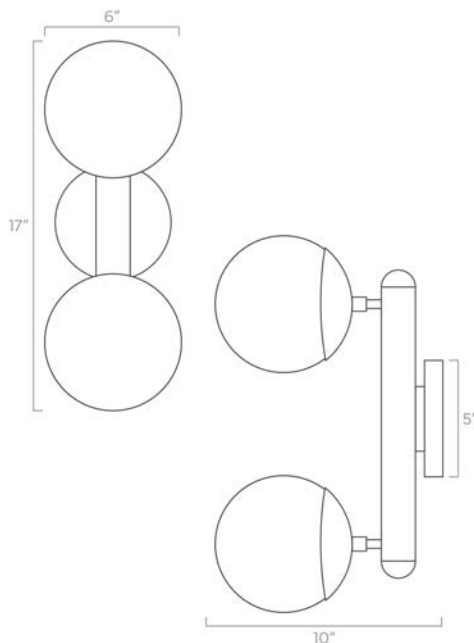

Dimensions

17" x 6" x 10"

Weight

4 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Legend 3 Sconce

SKU: 30320




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

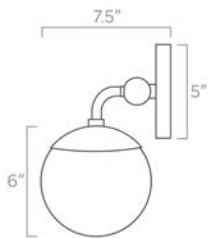

Dimensions


23" x 10.5" x 7.5"

Weight

5 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

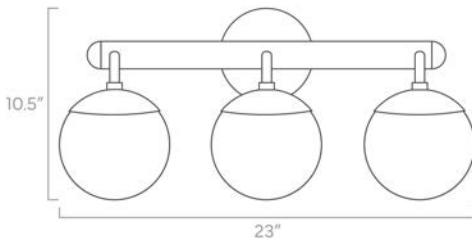

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Materials

- Aluminum
- Brass
- Opal glass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Icon 3 Sconce

SKU: 30321




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

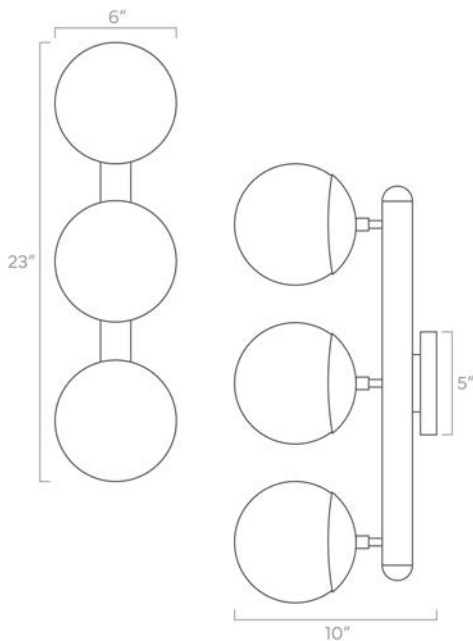

Dimensions

23" x 6" x 10"

Weight

5 lb

Rating

- (3) Medium base E26 sockets
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally
- Installs on wall or ceiling

Materials

- Aluminum
- Brass
- Opal glass

Engage



duttonbrown.com/engage

Boom Sconce - No Arm

SKU: 40120-0




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

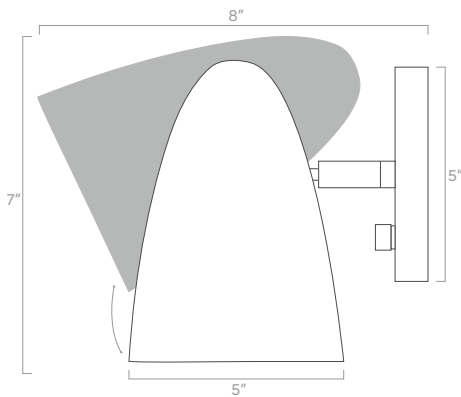

Dimensions

7" x 5" x 8"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada




Engage



duttonbrown.com/engage

Boom Sconce - 3" Arm

SKU: 40120-3

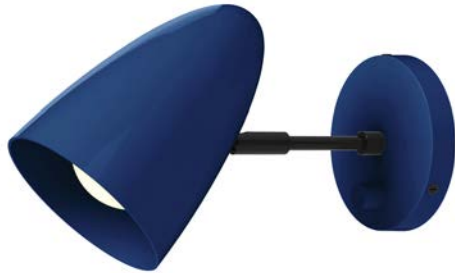


Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

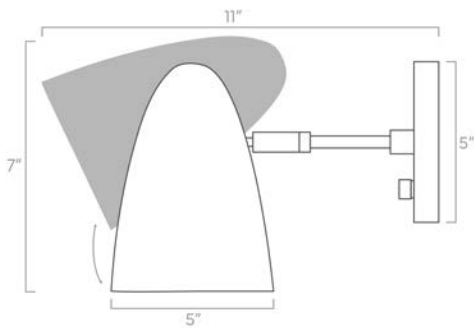

Dimensions

7" x 5" x 11"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada




Engage



duttonbrown.com/engage

Boom Sconce - 6" Arm

SKU: 40120-6

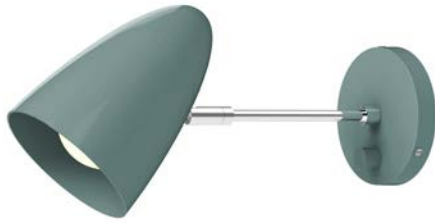


Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

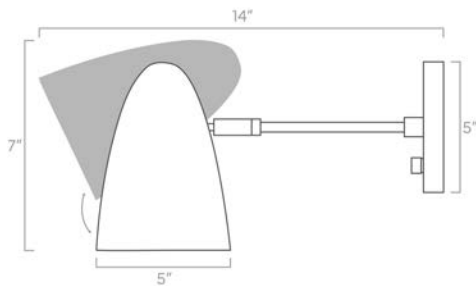

Dimensions

7" x 5" x 14"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Sconce - 10" Arm

SKU: 40120-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

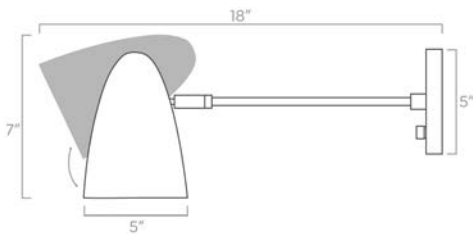

Dimensions

7" x 5" x 18"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Swing Arm Sconce - 9" Arm

SKU: 40121-9



Finish Options

-  Brass
-  Nickel
-  Black

Color Options

- | | |
|--|---|
|  White |  Ochre |
|  Bone |  Orange |
|  Spa |  Riding Hood Red |
|  Python Green |  Barely |
|  Lagoon |  Chalk |
|  Cobalt |  Black |
|  Slate Blue | |

duttonbrown.com/finishes

Dimensions

15" radius from wall x 14" tall

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Arm swings L/R
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Boom Swing Arm Sconce - 17" Arm

SKU: 40121-17




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

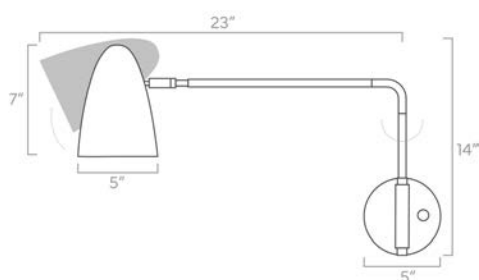

Dimensions

23" radius from wall x 14" tall

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Arm swings L/R
- Shade swivels U/D L/R

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Cadbury Sconce 8"

SKU: 50120-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

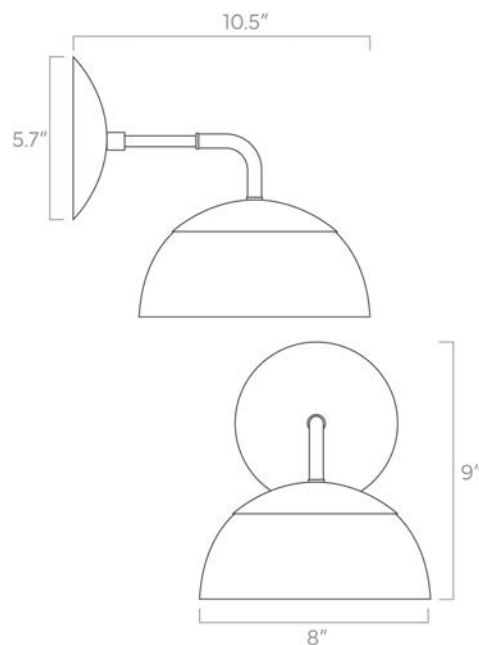

Dimensions

9" x 8" x 10.5"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Cadbury Sconce 10"

SKU: 50120-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

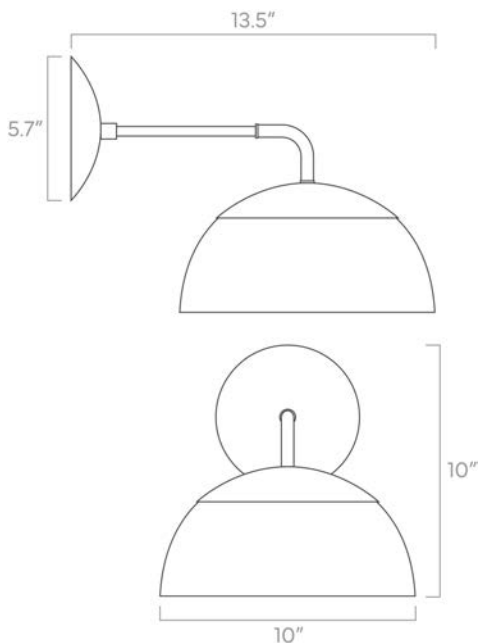

Dimensions

10" x 10" x 13.5"

Weight

3 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Sconce 8"

SKU: 50121-8





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

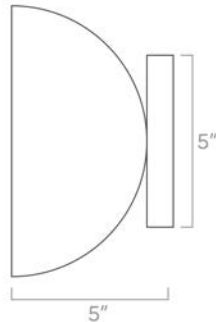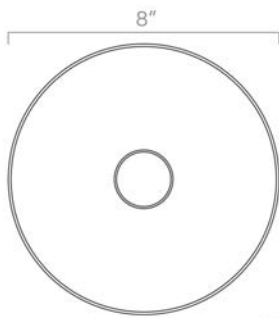

Dimensions

8" x 8" x 5"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Hemi Sconce 10"

SKU: 50121-10





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

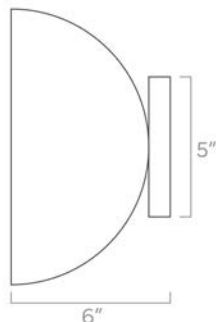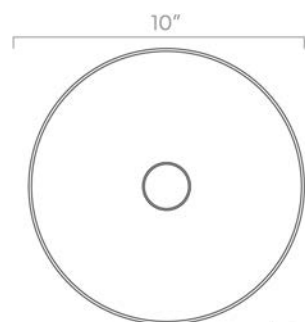

Dimensions

10" x 10" x 6"

Weight

3 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Amigo Sconce

SKU: 50220




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

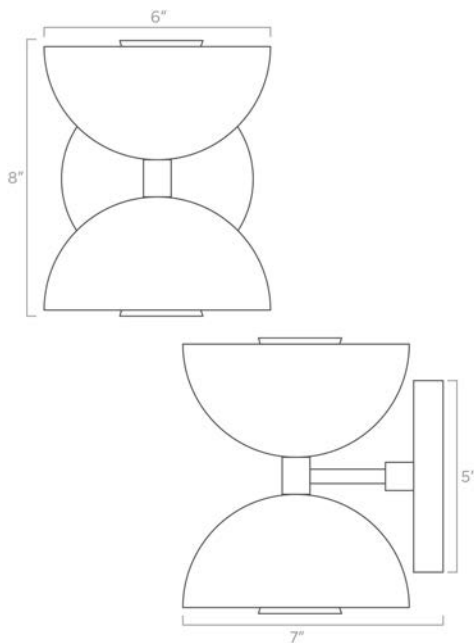

Dimensions

8" x 6" x 7"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Beso Sconce

SKU: 50221





Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | Black |

duttonbrown.com/finishes

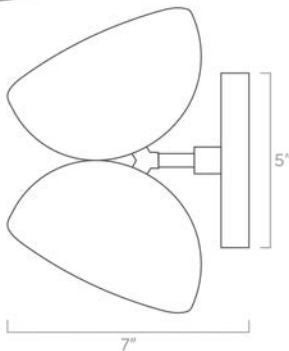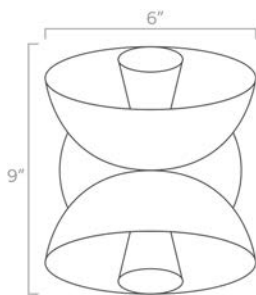

Dimensions

9" x 6" x 7"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Snug Sconce

SKU: 60121




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

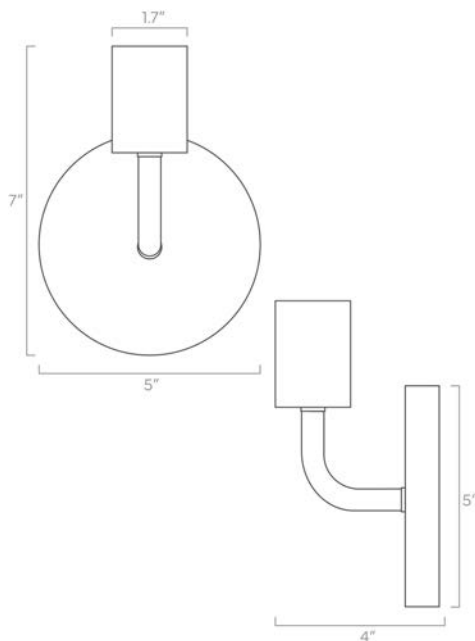

Dimensions

7" x 5" x 4"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Tall Snug Sconce

SKU: 60123




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

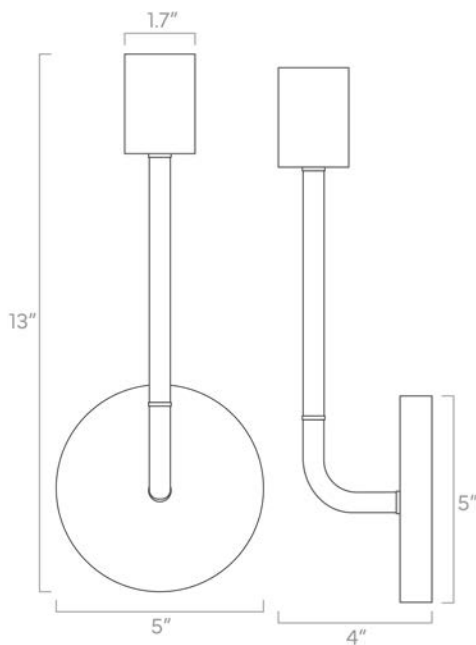

Dimensions

13" x 5" x 4"

Weight

1 lb

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Reader Sconce - No Arm

SKU: 60124-0




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

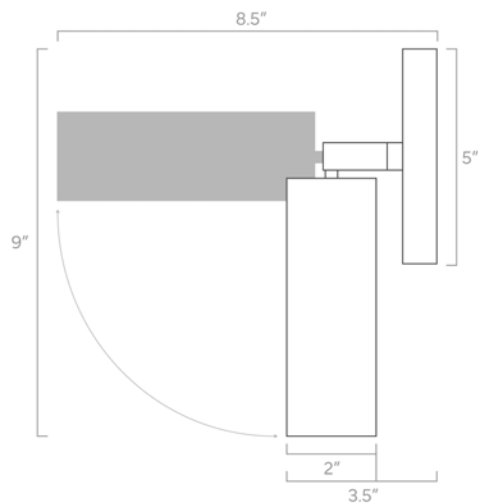

Dimensions

9" x 5" x 8.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Sconce - 3" Arm

SKU: 60124-3




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

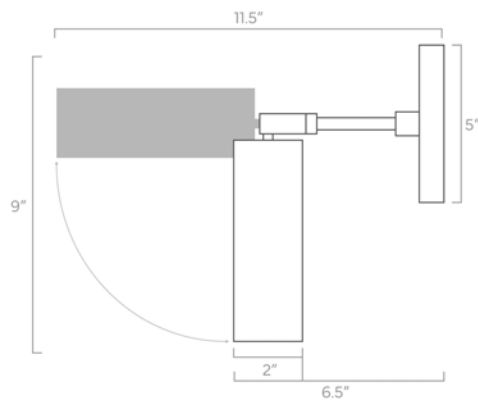

Dimensions

9" x 5" x 11.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Sconce - 6" Arm

SKU: 60124-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

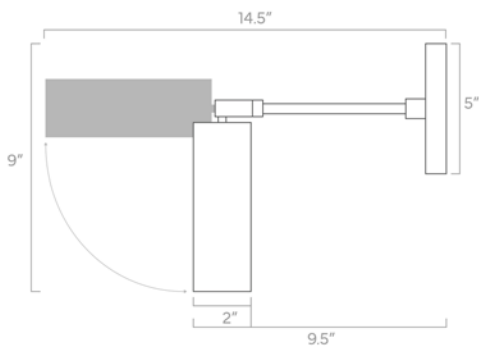

Dimensions

9" x 5" x 14.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Sconce - 10" Arm

SKU: 60124-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

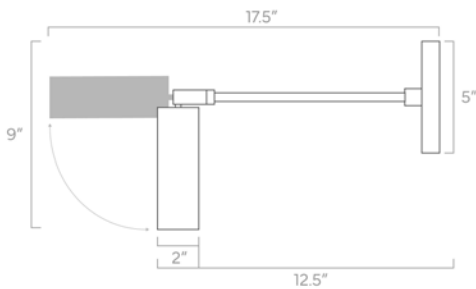

Dimensions

9" x 5" x 17.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada




Engage



duttonbrown.com/engage

Twink Sconce

SKU: 60125

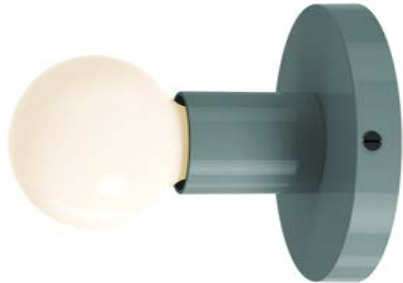


Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

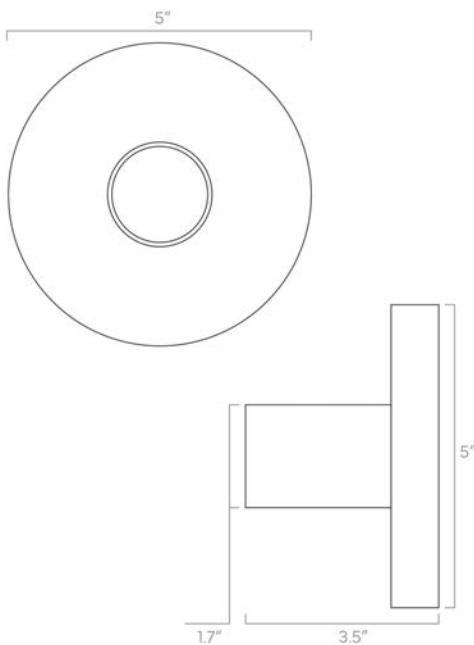

Dimensions

5" x 5" x 3.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Display Sconce

SKU: 60127




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

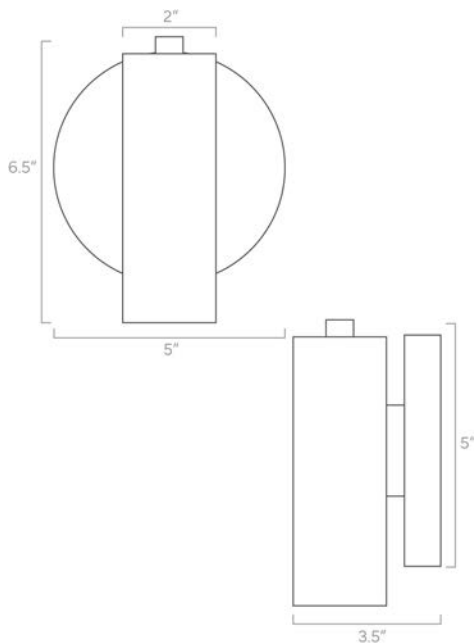

Dimensions

6.5" x 5" x 3.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Swing Arm Sconce - 9" Arm

SKU: 60128-9




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

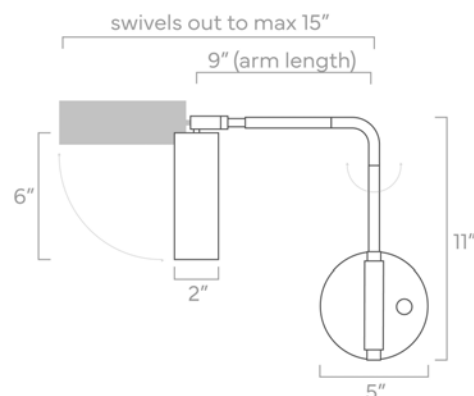

Dimensions

15" radius from wall x 11" tall

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Reader Swing Arm Sconce - 17" Arm

SKU: 60128-17




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

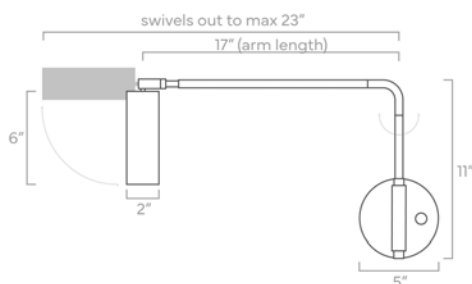

Dimensions

23" radius from wall x 11" tall

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Materials

- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Major Sconce 9"

SKU: 60129-9




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

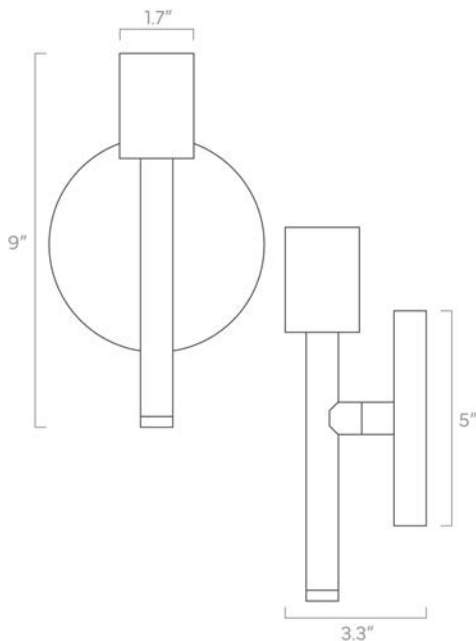

Dimensions

9" x 5" x 3.3"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Engage



duttonbrown.com/engage

Major Sconce 15"

SKU: 60129-15




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

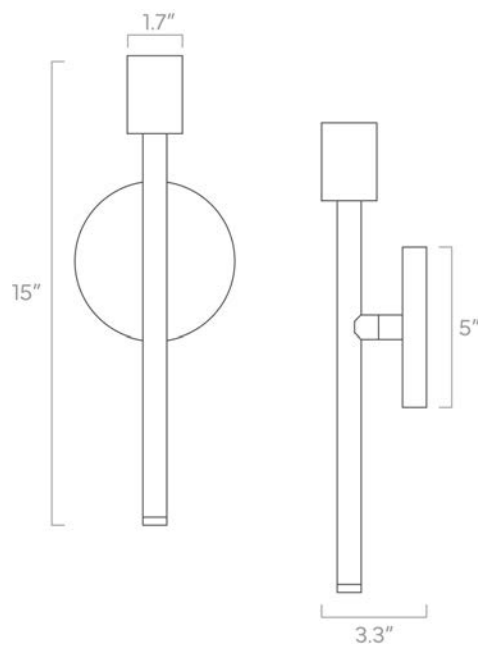

Dimensions

15" x 5" x 3.3"

Weight

1 lb

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Major Sconce 21"

SKU: 60129-21




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

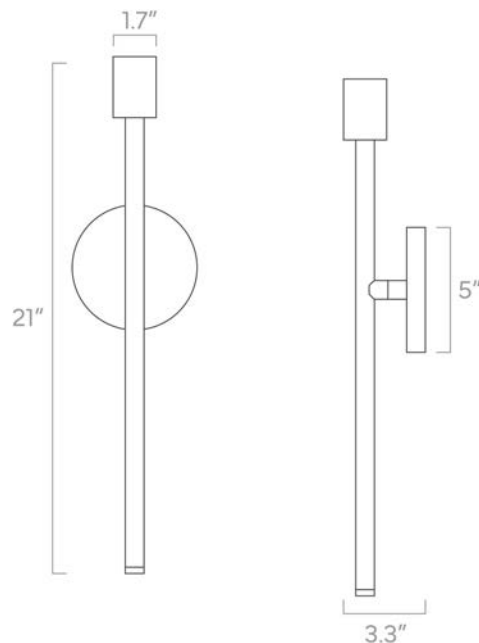

Dimensions

21" x 5" x 3.3"

Weight

2 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs up or down

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Engage



duttonbrown.com/engage

Scepter Sconce 10"

SKU: 60220




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

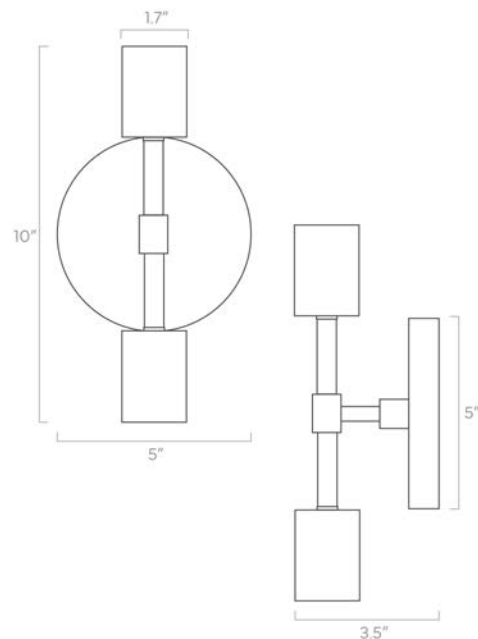

Dimensions

10" x 5" x 3.5"

Weight

1 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Engage



duttonbrown.com/engage

Scepter Sconce 18"

SKU: 60221




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

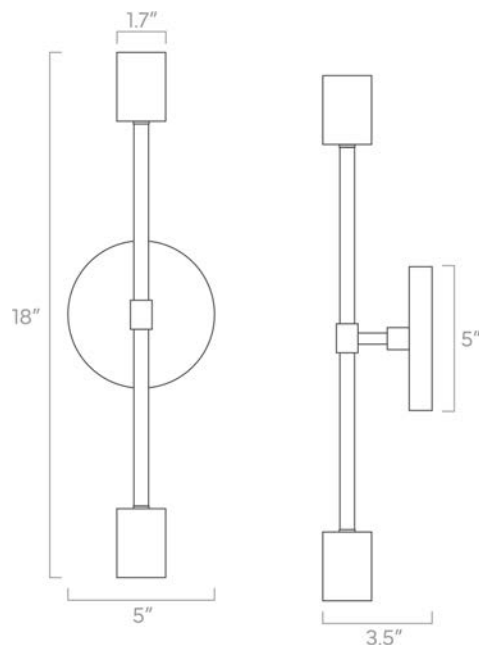

Dimensions

18" x 5" x 3.5"

Weight

1 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Monarch Sconce

SKU: 60222




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

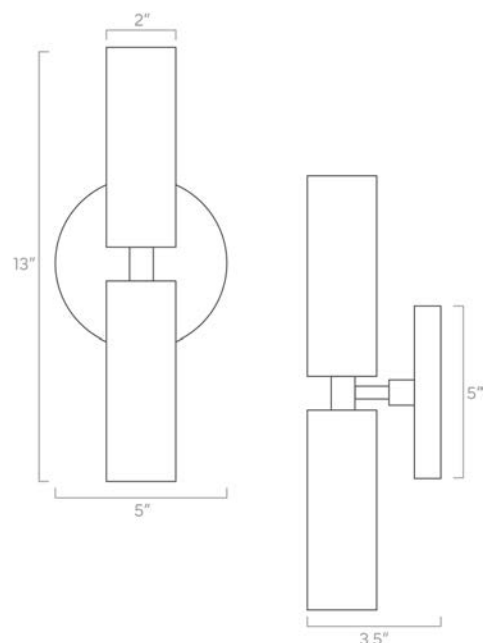

Dimensions

13" x 5" x 3.5"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Ruler Sconce

SKU: 60224




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

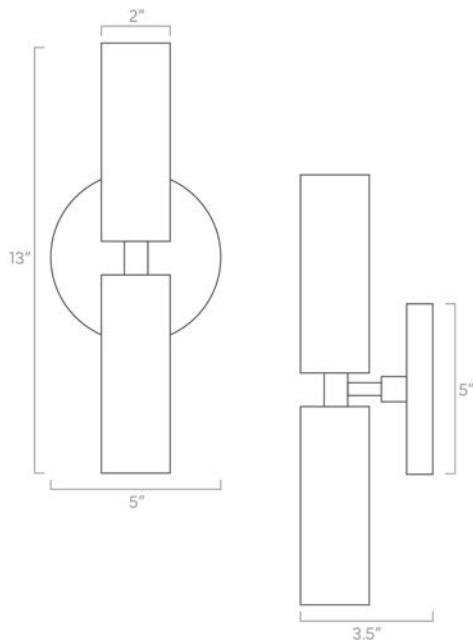

Dimensions

13" x 5" x 3.5"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
 - 120V, MAX 7W per socket
 - (2) LED PAR16 bulbs included.
- 4.5W, 450 lm, 3000K.

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Pilot Sconce 11"

SKU: 60226-11




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

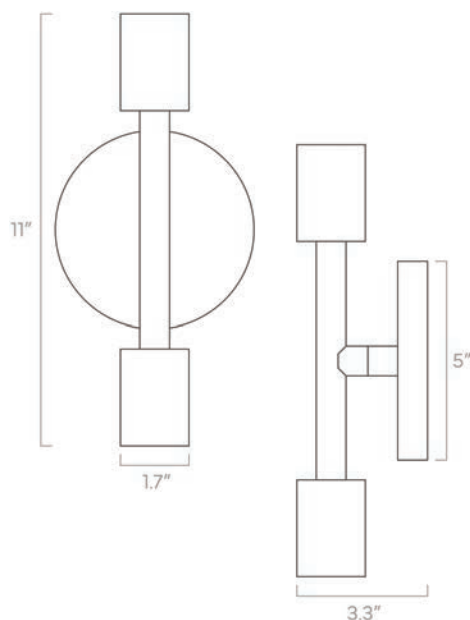

Dimensions

11" x 5" x 3.3"

Weight

1 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Engage



duttonbrown.com/engage

Pilot Sconce 17"

SKU: 60226-17




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

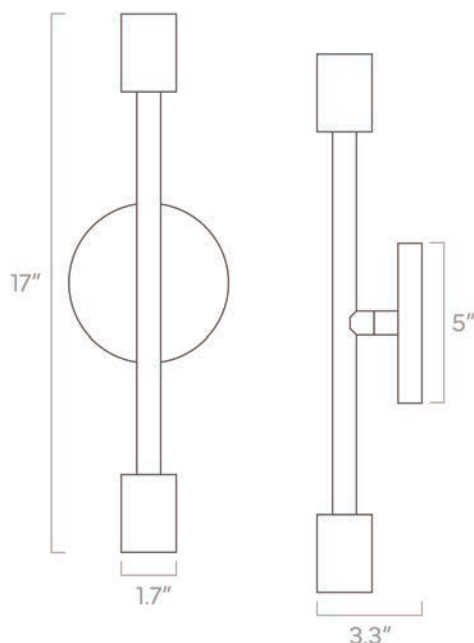

Dimensions

17" x 5" x 3.3"

Weight

1 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Pilot Sconce 23"

SKU: 60226-23




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

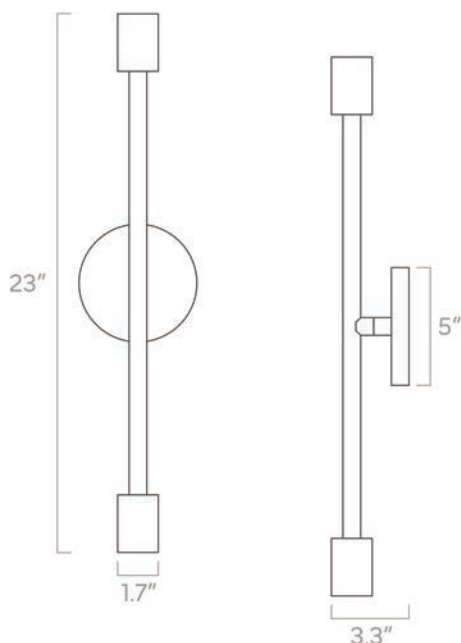

Dimensions

23" x 5" x 3.3"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Pilot Sconce 29"

SKU: 60226-29




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

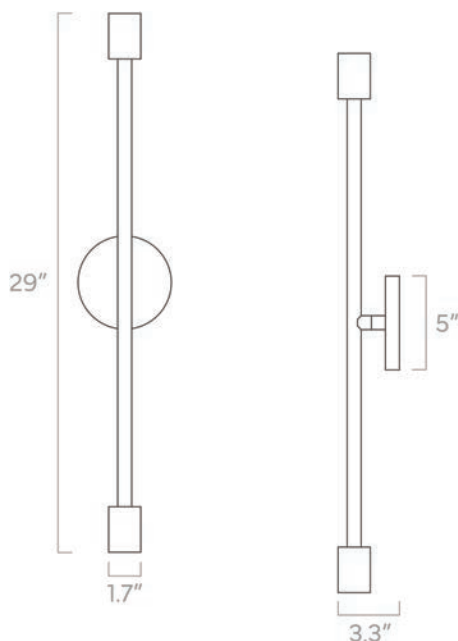

Dimensions

29" x 5" x 3.3"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada
- ADA compliant



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Aluminum
- Brass

Engage



duttonbrown.com/engage

Vogue 4 Sconce

SKU: 60420



Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black


duttonbrown.com/finishes

Dimensions

18" x 5" x 4.5"

Weight

3 lb

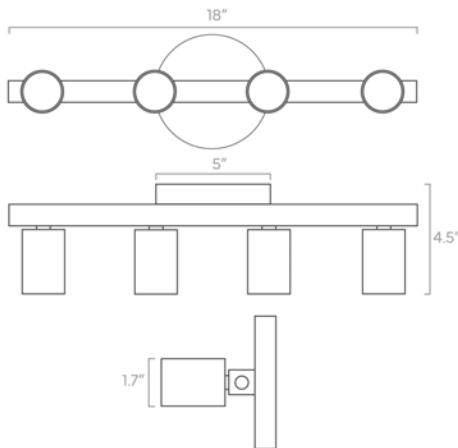

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (4) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Vogue 7 Sconce

SKU: 60720



Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

Dimensions


30" x 5" x 4.5"

Weight

4 lb

Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

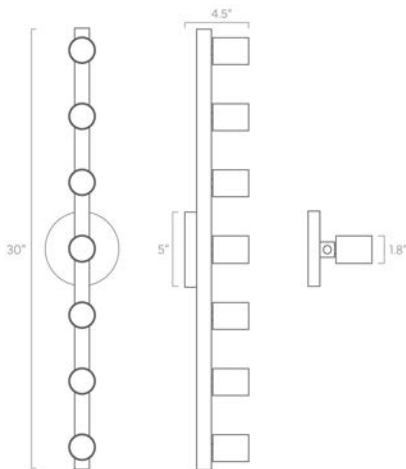

Rating

- (7) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Lepore Sconce


SKU: 70122



Color Options

White	Ochre
Bone	Orange
Spa	Riding Hood Red
Python Green	Barely
Lagoon	Chalk
Cobalt	Black
Slate Blue	

duttonbrown.com/finishes

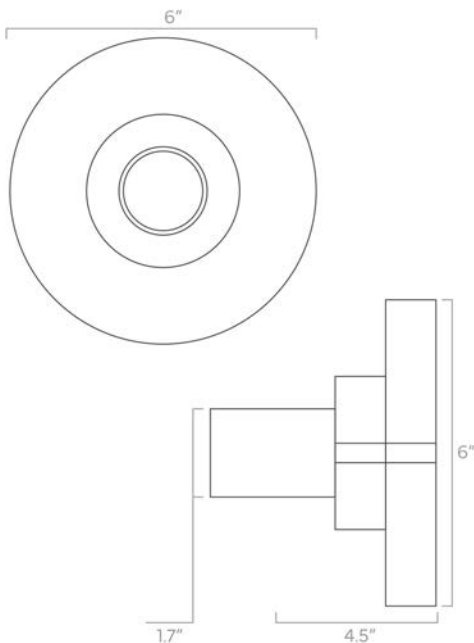

Dimensions

6" x 6" x 4.5"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs on wall or ceiling

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Acrylic
- Aluminum
- Brass

Certifications

- UL listed for dry locations in USA & Canada



Engage



duttonbrown.com/engage

Bianca Sconce 12"

SKU: 70220




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

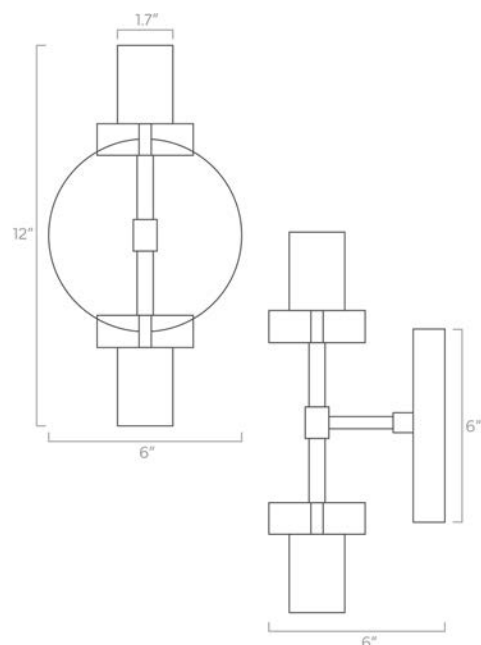

Dimensions

12" x 6" x 6"

Weight

2 lb

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Materials

- Acrylic
- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada



Engage



duttonbrown.com/engage

Phoenix Sconce

SKU: 70221




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

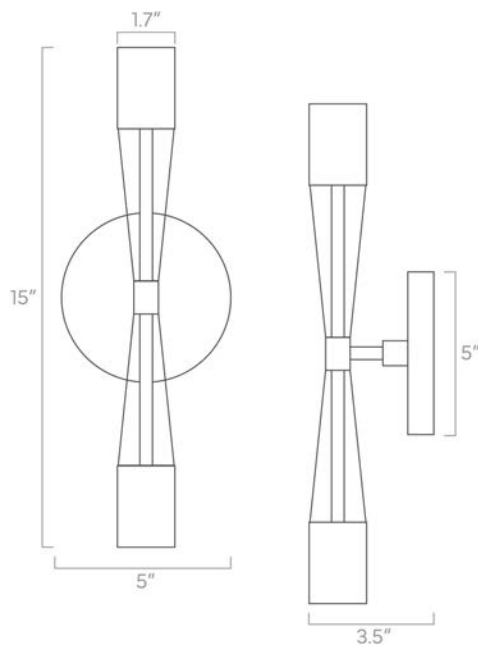

Dimensions

15" x 5" x 3.5"

Weight

2 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired. Plug-in option available.
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Acrylic
- Aluminum
- Brass

Engage



duttonbrown.com/engage

Bianca Sconce 20"

SKU: 70222




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

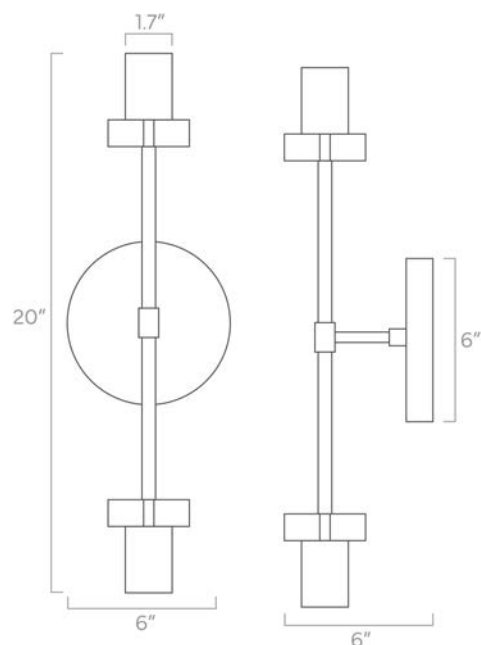

Dimensions

20" x 6" x 6"

Weight

3 lb

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Energy efficiency relabeling available by request

Certifications

- UL listed for damp locations in USA & Canada



Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Installs vertically or horizontally

Materials

- Acrylic
- Aluminum
- Brass

Engage



duttonbrown.com/engage