

Cap Pendant 6"

SKU: 30110-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

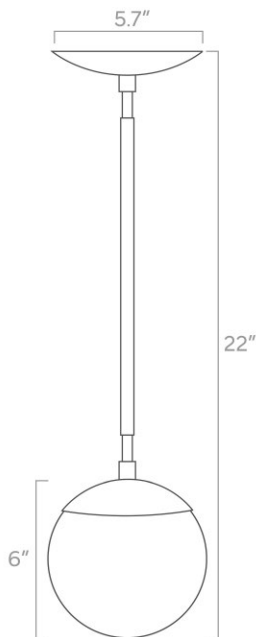

Dimensions

22" x Ø6"

Weight

1 lb

Installed Height

22"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cap Pendant 8"

SKU: 30110-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

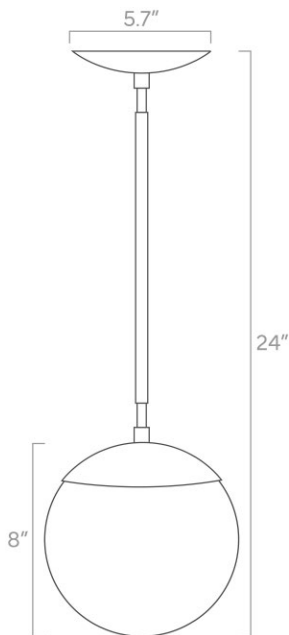

Dimensions

24" x Ø8

Weight

2 lb

Installed Height

24"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cap Pendant 10"

SKU: 30110-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

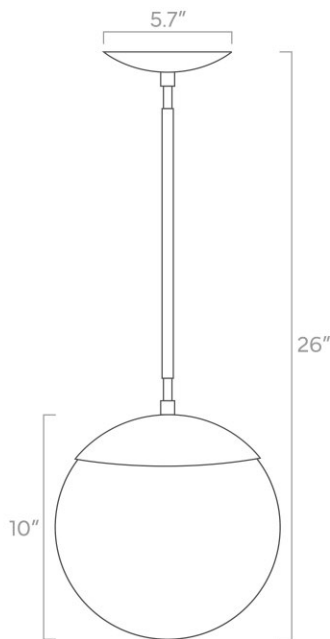

Dimensions

26" x Ø10"

Weight

3 lb

Installed Height

26"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cap Pendant 12"

SKU: 30110-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

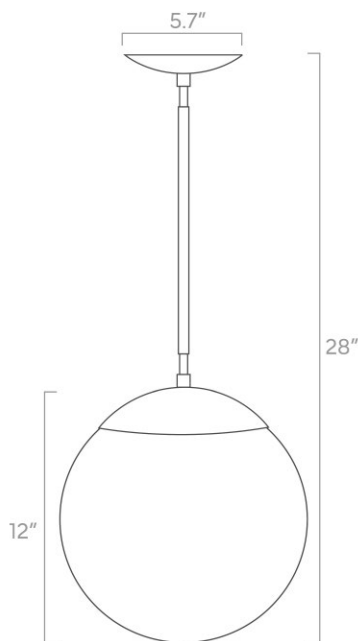

Dimensions

28" x Ø12"

Weight

4 lb

Installed Height

28"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 6"

SKU: 30112-6




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

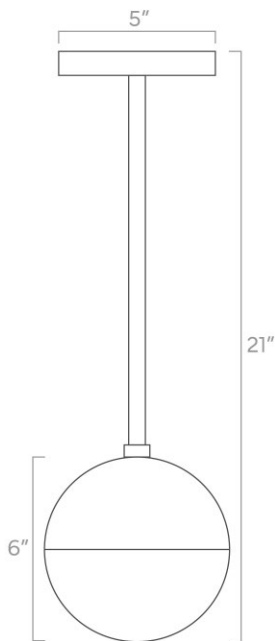

Dimensions

21" x Ø6"

Weight

2 lb

Installed Height

21"

Rating

- (1) Medium base E26 socket
- 120V, MAX 9W per socket
- Use A15 or G16 bulbs only (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 8"

SKU: 30112-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

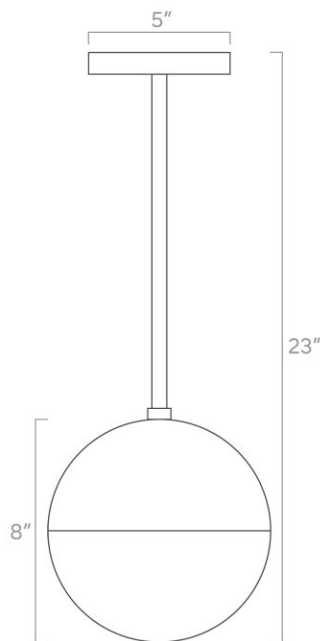

Dimensions

23" x Ø8"

Weight

3 lb

Installed Height

23"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 10"

SKU: 30112-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

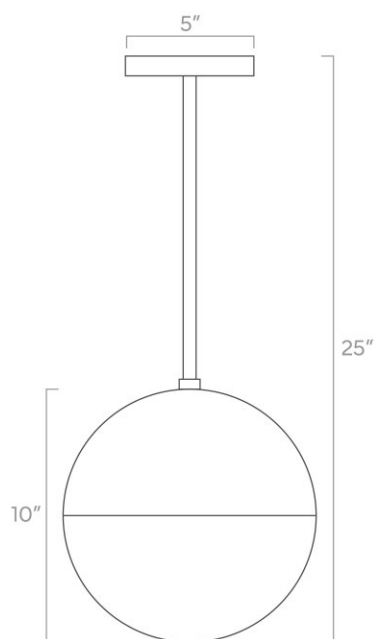

Dimensions

25" x Ø10"

Weight

4 lb

Installed Height

25"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Lure Pendant 12"

SKU: 30112-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

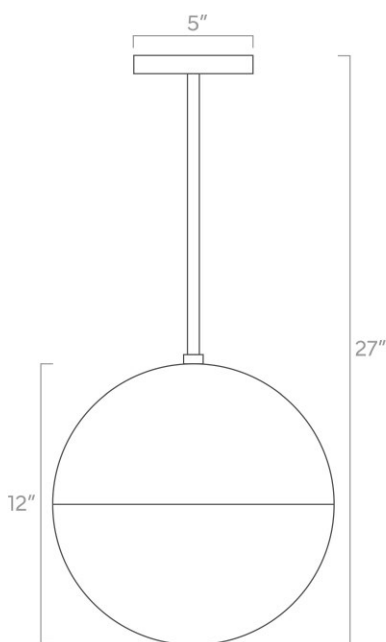

Dimensions

27" x Ø12"

Weight

5 lb

Installed Height

27"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Maxo Pendant 8"

SKU: 40111-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

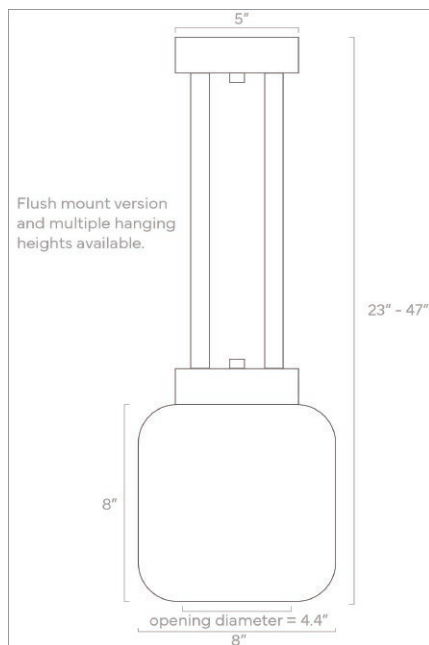

Dimensions

Variable x Ø8"

Weight

3 lb

Installed Height

23", 35", 47" (variable)

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Shade installs via 1-5/8" UNO hole/thread

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Maxo Pendant 13"

SKU: 40111-13




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

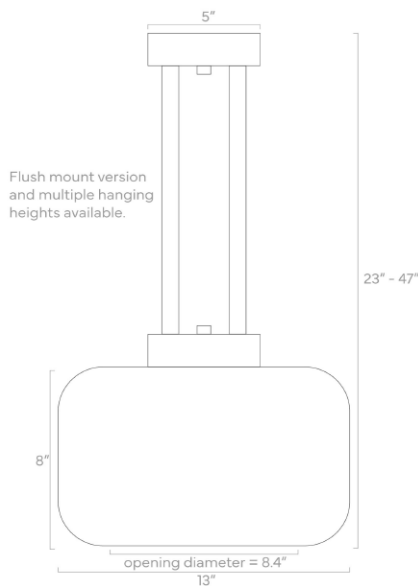

Dimensions

Variable x Ø13"

Weight

4 lb

Installed Height

23", 35", 47" (variable)

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)
- Shade installs via 1-5/8" UNO hole/thread

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.
- Available as flush mount

Materials

- Aluminum
- Brass
- Opal Glass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cadbury Pendant 8"

SKU: 50110-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

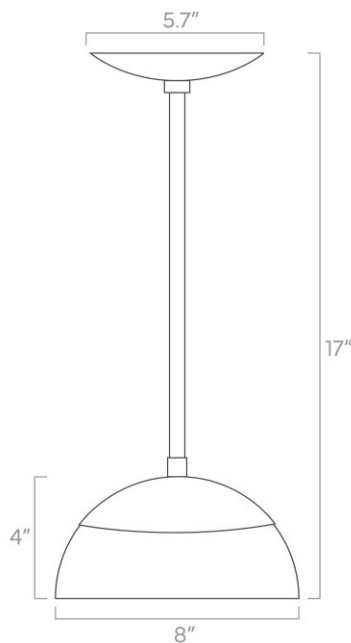

Dimensions

17" x Ø8"

Weight

2 lb

Installed Height

17"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cadbury Pendant 10"

SKU: 50110-10




Finish Options

-  Brass
-  Nickel
-  Black

Color Options

- | | |
|--|---|
|  White |  Ochre |
|  Bone |  Orange |
|  Spa |  Riding Hood Red |
|  Python Green |  Barely |
|  Lagoon |  Chalk |
|  Cobalt |  Black |
|  Slate Blue | |

duttonbrown.com/finishes

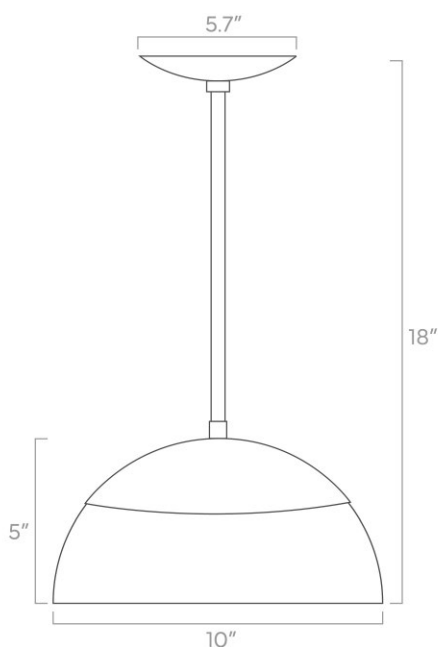

Dimensions

18" x Ø10"

Weight

3 lb

Installed Height

18"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Cadbury Pendant 12"

SKU: 50110-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

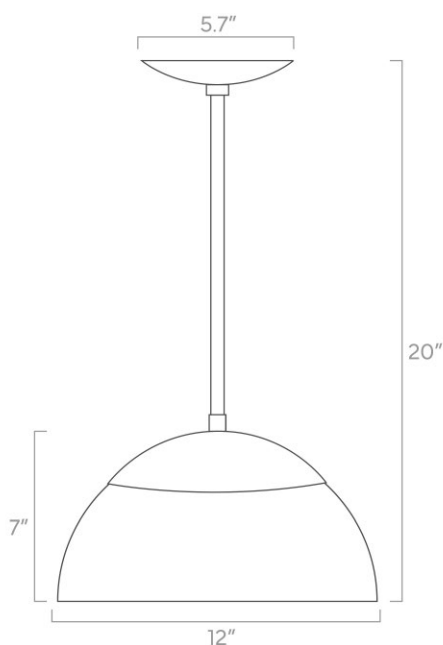

Dimensions

20" x Ø12"

Weight

4 lb

Installed Height

20"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Echo Pendant 8"

SKU: 50111-8




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

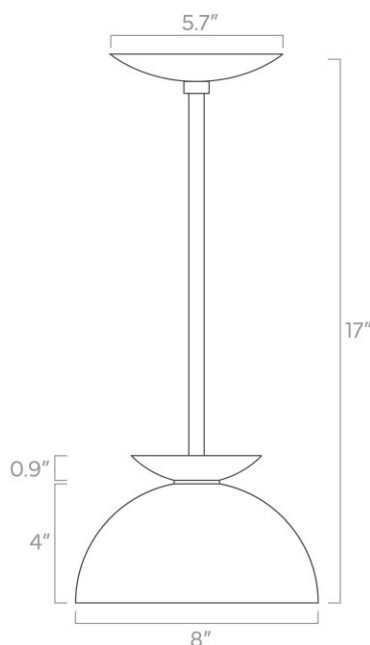

Dimensions

17" x Ø8"

Weight

2 lb

Installed Height

17"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Echo Pendant 10"

SKU: 50111-10




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

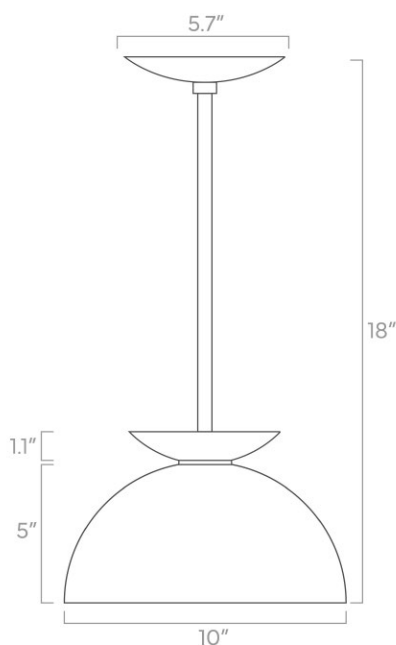

Dimensions

18" x Ø10"

Weight

3 lb

Installed Height

18"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Echo Pendant 12"

SKU: 50111-12




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

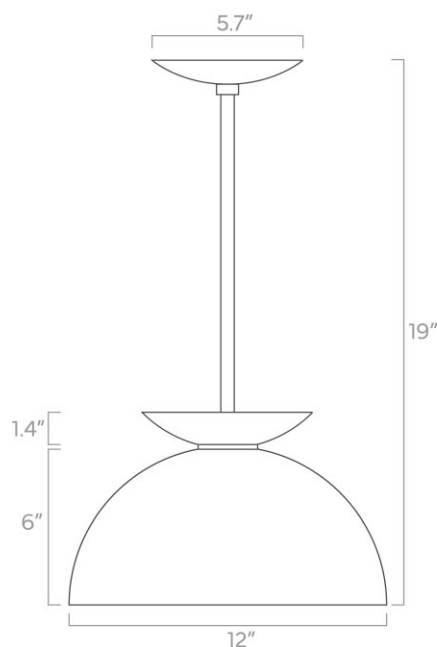

Dimensions

19" x Ø12"

Weight

3 lb

Installed Height

19"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Reader Pendant

SKU: 60110




Finish Options

- Brass
- Nickel
- Black

Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

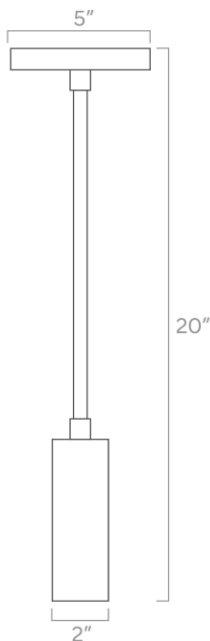

Dimensions

20" x Ø5"

Weight

2 lb

Installed Height

20"

Rating

- (1) Medium base E26 socket
- 120V, MAX 7W per socket
- LED PAR16 bulb included. 4.5W, 450 lm, 3000K.

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engagew



duttonbrown.com/engage

Eureka Pendant

SKU: 60111




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

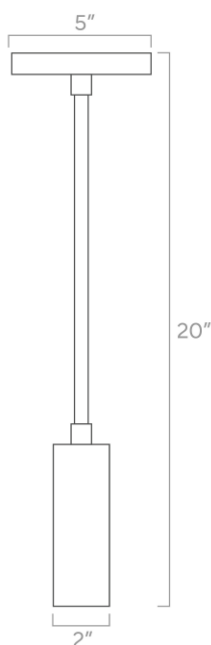

Dimensions

20" x Ø5"

Weight

2 lb

Installed Height

20"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Twink Pendant

SKU: 60112



Finish Options

-  Brass
-  Nickel
-  Black

Color Options

- | | |
|--|---|
|  White |  Ochre |
|  Bone |  Orange |
|  Spa |  Riding Hood Red |
|  Python Green |  Barely |
|  Lagoon |  Chalk |
|  Cobalt |  Black |
|  Slate Blue | |

duttonbrown.com/finishes



Dimensions

15" x Ø5"

Weight

1 lb

Installed Height

15"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Pilot Pendant 29"


SKU: 60210



Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

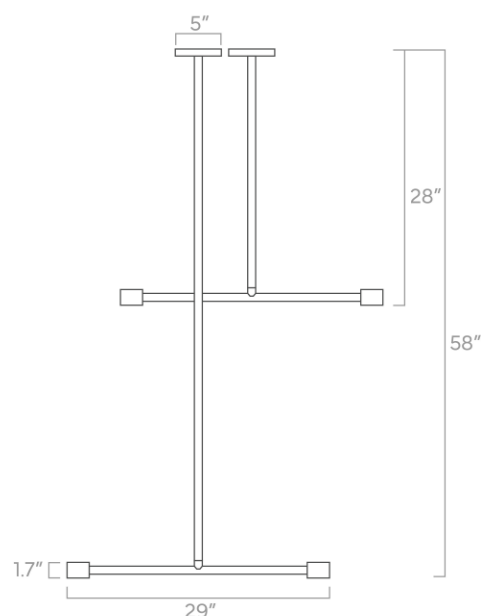

Dimensions

29" x 1.7" x 1.7"

Weight

Variable

Installed Height

28", 34", 40", 46", 52" or 58"

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Pilot Pendant 47"


SKU: 60211



Color Options

- | | |
|--------------|-----------------|
| White | Ochre |
| Bone | Orange |
| Spa | Riding Hood Red |
| Python Green | Barely |
| Lagoon | Chalk |
| Cobalt | Black |
| Slate Blue | |

duttonbrown.com/finishes

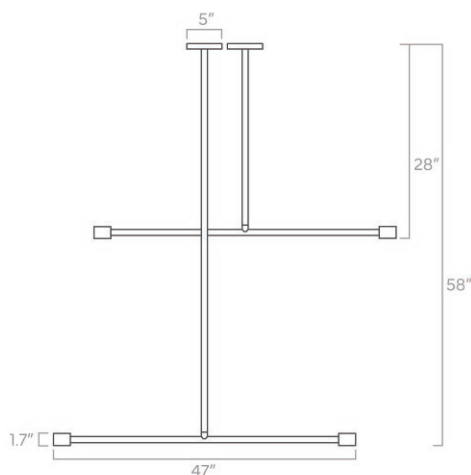

Dimensions

47" x 1.7" x 1.7"

Weight

Variable

Installed Height

28", 34", 40", 46", 52" or 58"

Rating

- (2) Medium base E26 sockets
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes pre-cut rods to install at specified height. Increased height available by request.

Materials

- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage

Bling Pendant

SKU: 70110




Finish Options

- Brass
- Nickel
- Black

Color Options

- White
- Bone
- Spa
- Python Green
- Lagoon
- Cobalt
- Slate Blue
- Ochre
- Orange
- Riding Hood Red
- Barely
- Chalk
- Black

duttonbrown.com/finishes

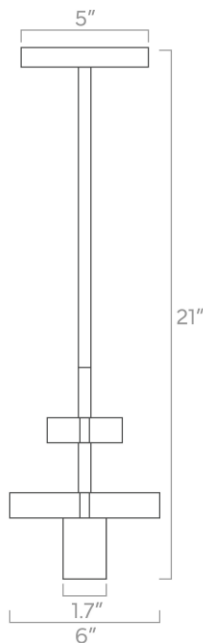

Dimensions

21" x Ø6"

Weight

2 lb

Installed Height

21"

Rating

- (1) Medium base E26 socket
- 120V, MAX 15W per socket
- Recommend Type A or Type G bulbs (not included)

Configuration

- Hardwired
- Dimmable with compatible bulbs & dimmer
- Includes 12" rod. Extension rods available.
- Available as flush mount

Materials

- Acrylic
- Aluminum
- Brass

Certifications

- UL listed for damp locations in USA & Canada.



Engage



duttonbrown.com/engage