


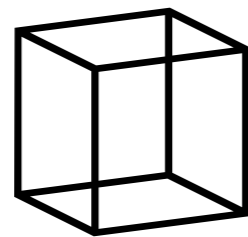

Room Dividers Inspirational Folder

August 2020



Making Space Work

Adaptable. Durable. Elegant.

GRID is an architectural interior system that conquers the challenges of any space. The adaptability of GRID gives its user the freedom to design a cohesive furniture system with multiple functions.

Here we show you examples of different kinds of room dividers and provide you with a component overview.


RoomDivider #1

- 30 basic module, white
- 5 shelf/side, white
- 17 shelf/side, oak
- 12 box side panel, oak
- 3 plant box insert, white

- G.NW
- SS.MW
- SS.MO
- PB.MO
- PBI.W

Metric
w: 2,406 mm
h: 2,005 mm
d: 401 mm

Imperial
w: 7' 10 23/32"
h: 6' 6 15/16"
d: 1' 3 25/32"

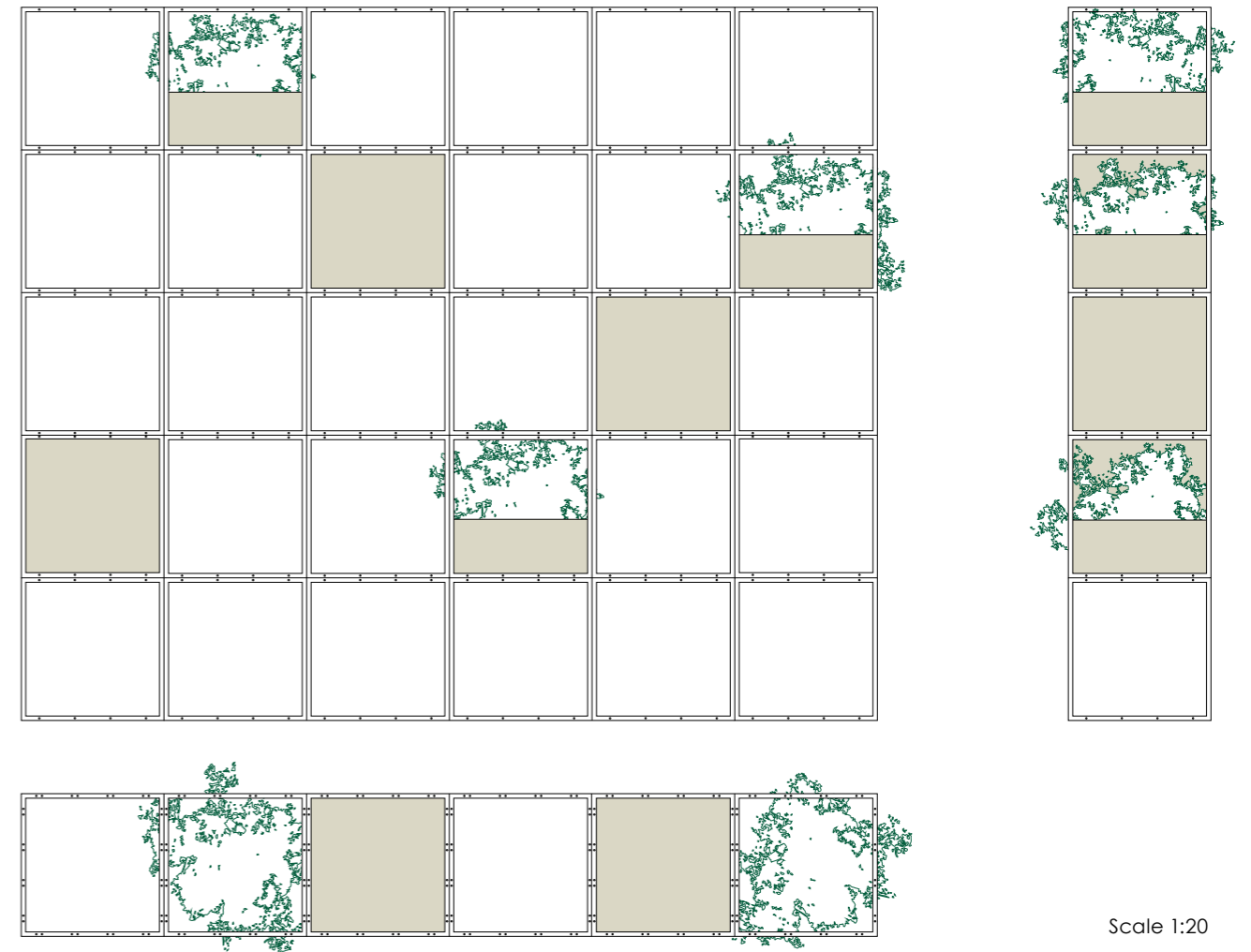


Scale 1:20



RoomDivider #2

- | | |
|------------------------------|---------|
| 12 basic module, black | G.NB |
| 18 shelf/side, black | SS.MB |
| 2 double side, black | DS.MB |
| 2 drawer insert 2, black | SM2.MB |
| 4 divider insert, black | DI.MB |
| 6 divider shelf, black | DIS.MB |
| 1 top/base/panel, 1x4, black | P1.4.MB |

Metric	Imperial
w: 1,604 mm	w: 5' 3 5/32"
h: 1,216 mm	h: 3' 11 7/8"
d: 413 mm	d: 1' 4 17/64"

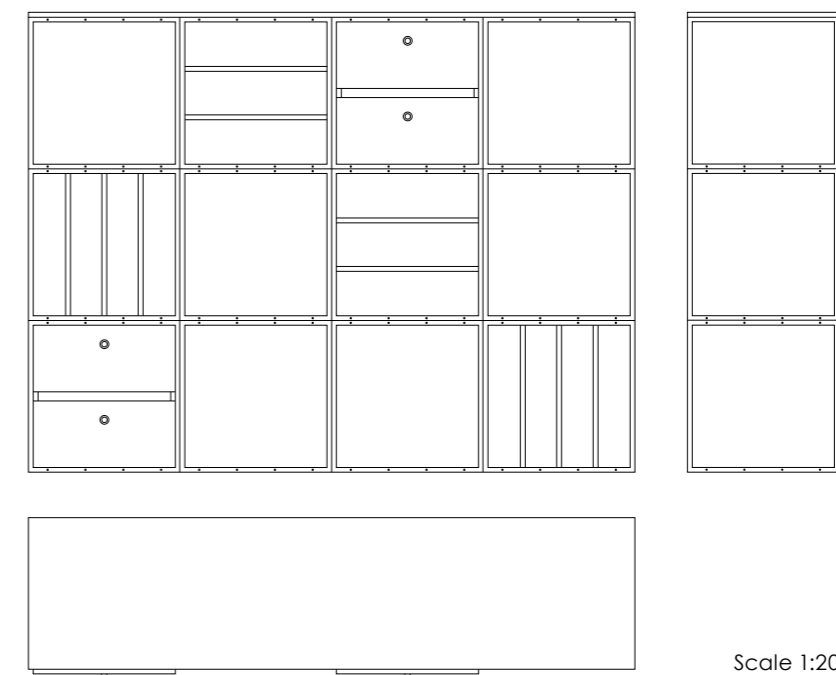

Scale 1:20



RoomDivider #3

30 basic module, white
 6 shelf/side, white
 22 shelf/side, oak
 12 box side panel, white
 3 plant box insert, white
 6 divider insert, white
 8 divider shelf, white

G.NW
 SS.MW
 SS.MO
 PB.MW
 PBI.W
 DI.MW
 DIS.MW

Metric
 w: 2,005 mm
 h: 2,406 mm
 d: 401 mm

Imperial
 w: 6' 6 15/16"
 h: 7' 10 23/32"
 d: 1' 3 25/32"





RoomDivider #4

- 28 basic module, black
 - 20 shelf/side, black
 - 5 double side, black
 - 2 panel, 2x2, black
 - 2 felt panel, 2x2, stone grey
 - 8 cut module, black
 - 4 cupboard Insert high, black
- G.NB
 - SS.MB
 - DS.MB
 - P2.2.MB
 - PF2.2.B-67
 - G.NB.CUT
 - SM4.MB

Metric
 w: 2.406 mm
 h: 2.406 mm
 d: 401 mm

Imperial
 w: 7' 10 23/32"
 h: 7' 10 23/32"
 d: 1' 3 25/32"

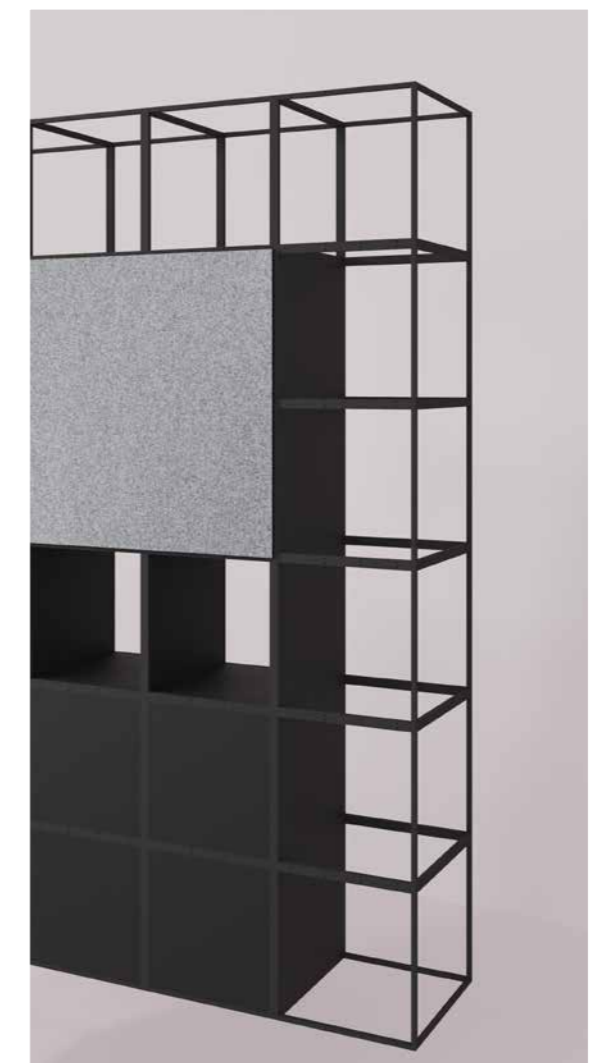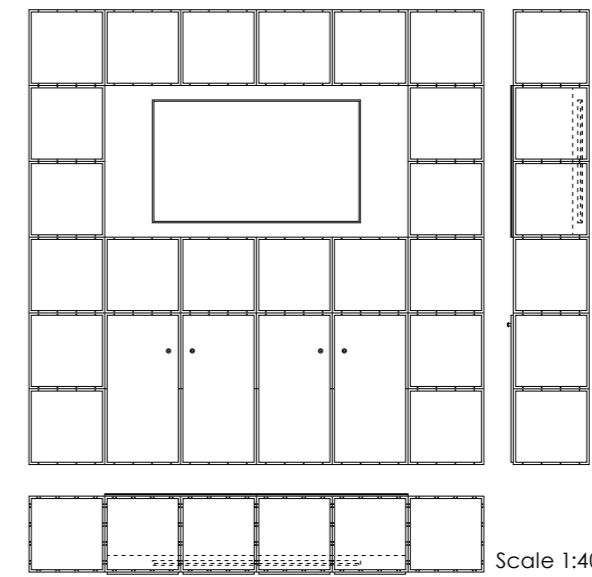






RoomDivider #5

36 basic module, white
 18 shelf/side, white
 22 shelf/side, oak

G.NW
 SS.MW
 SS.MO

Metric	Imperial
w: 3,609 mm	w: 11' 10 3/32"
h: 1,604 mm	h: 5' 3 5/32"
d: 401 mm	d: 1' 3 25/32"

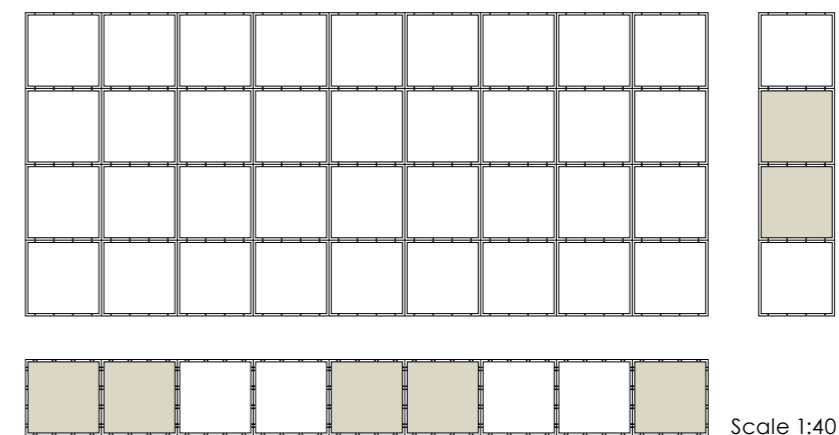

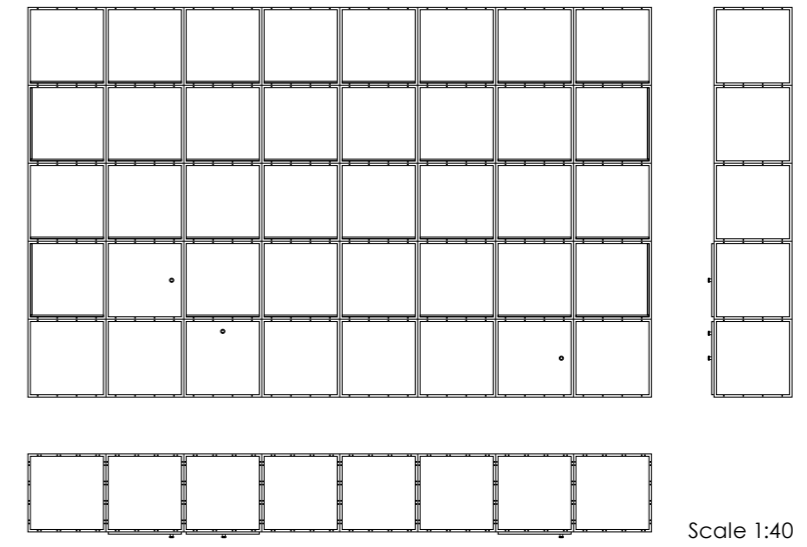
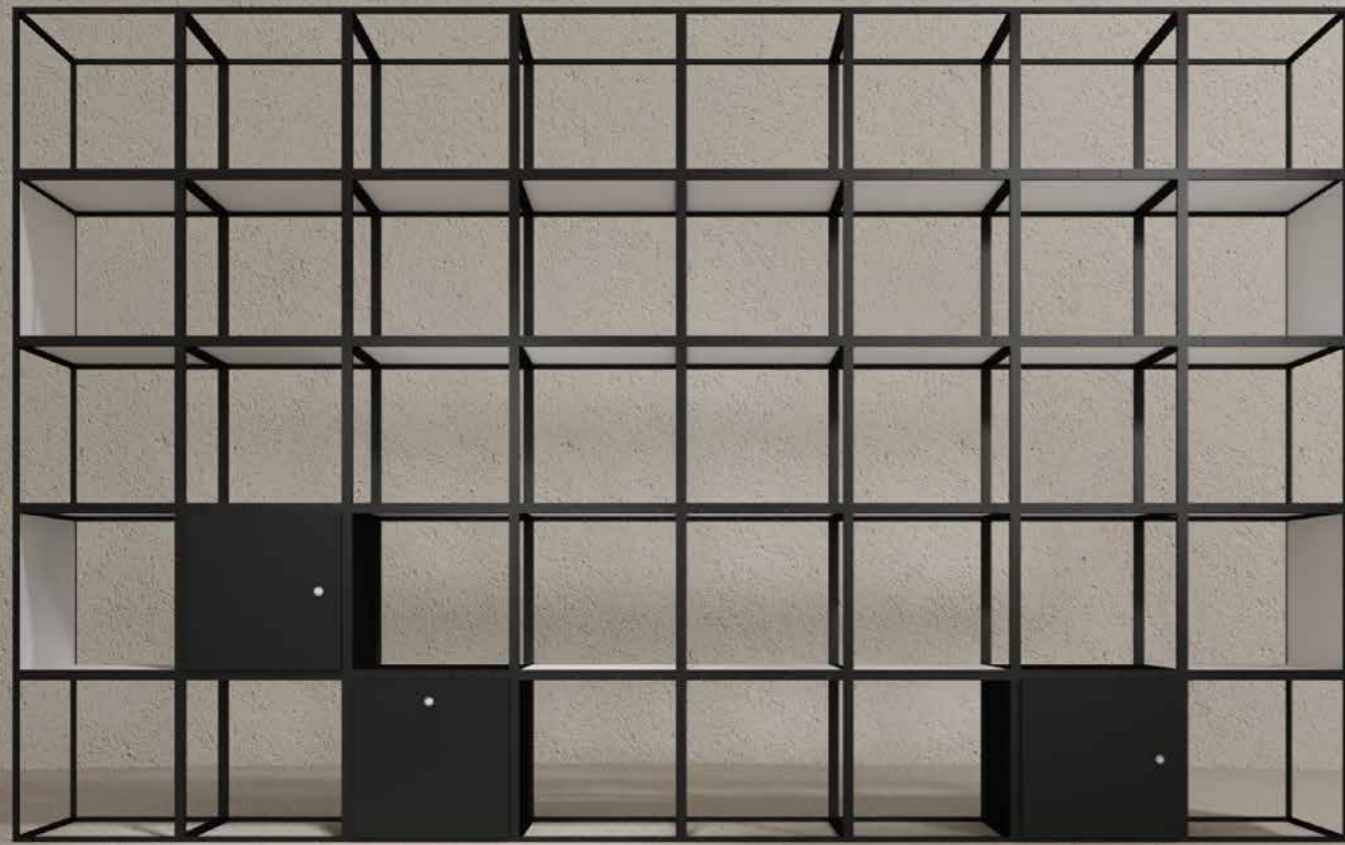


RoomDivider #6

- | | |
|--------------------------|--------|
| 40 basic module, black | G.NB |
| 32 shelf/side, white | SS.MW |
| 9 shelf/side, black | SS.MB |
| 1 drawer insert 1, black | SM1.MB |
| 2 cupboard insert, black | SM3.MB |

Metric	Imperial
w: 3,208 mm	w: 10' 6 19/64"
h: 2,005 mm	h: 6' 6 15/16"
d: 413 mm	d: 1' 4 17/64"



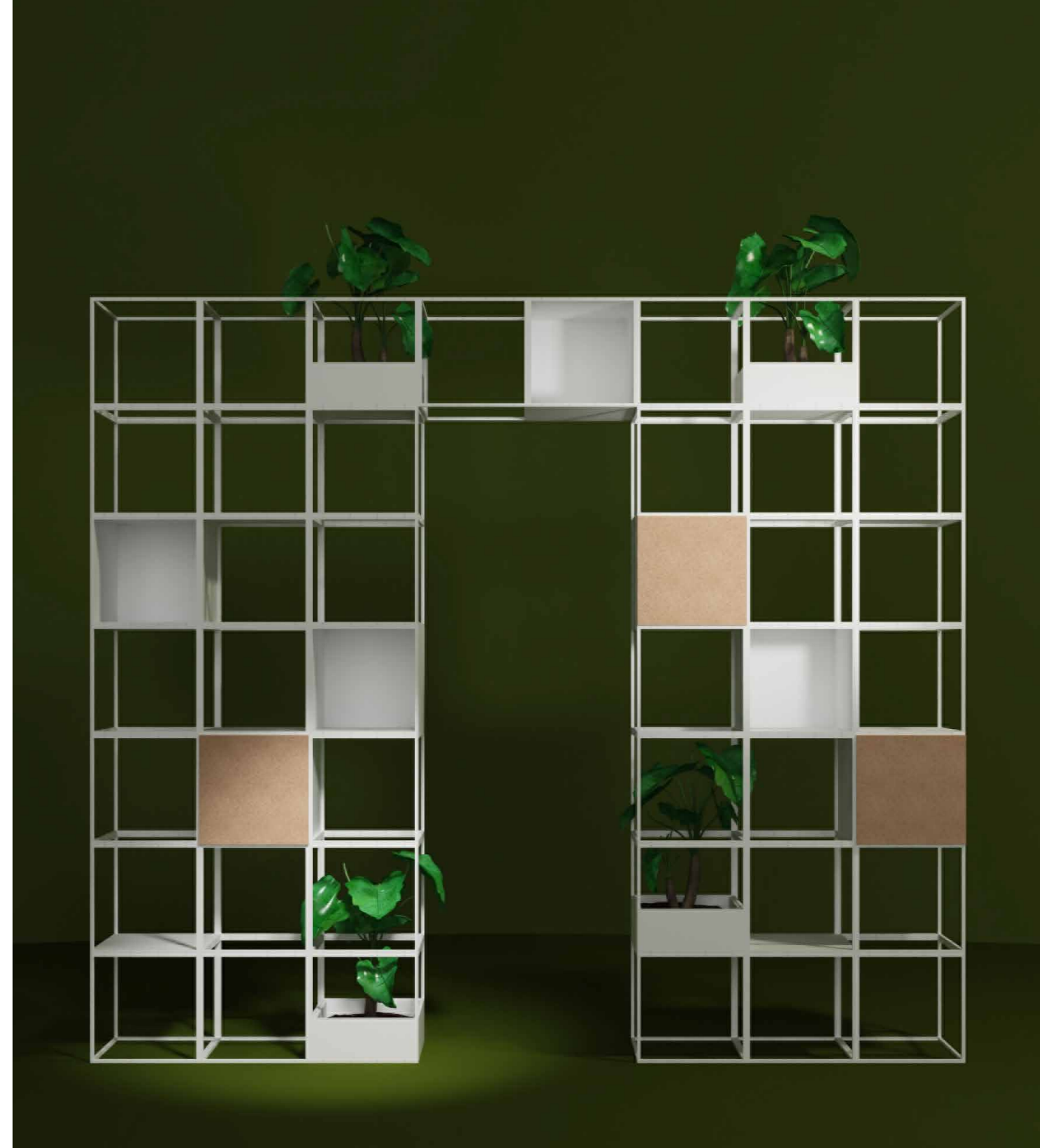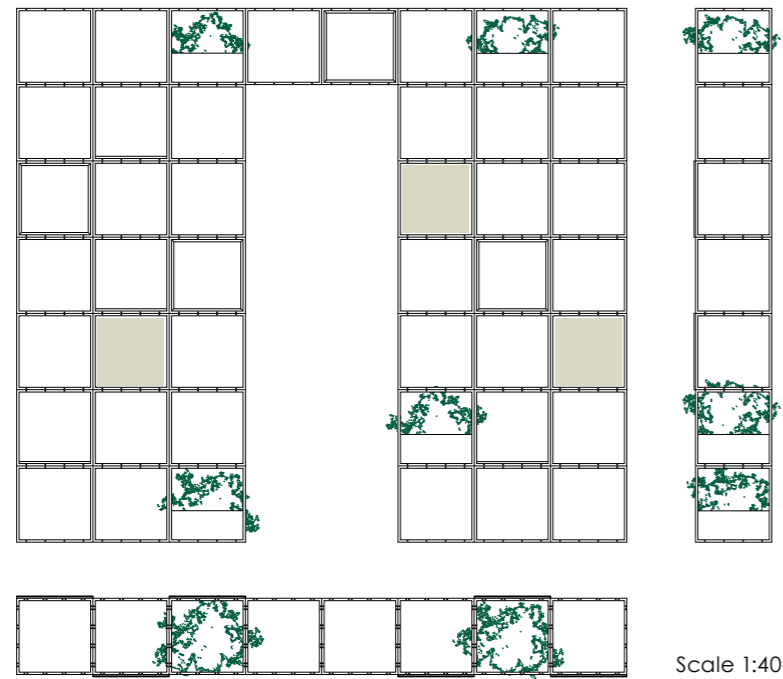

RoomDivider #7

44 basic module, white
 36 shelf/side, white
 16 box side panel, white
 4 plant box insert, white
 7 cork panel, 1x1, white

G.NW
 SS.MW
 PB.MW
 PBI.W
 PC1.1.W-C

Metric
 w: 3,208 mm
 h: 2,807 mm
 d: 401 mm

Imperial
 w: 10' 6 19/64"
 h: 9' 2 33/64"
 d: 1' 3 25/32"



RoomDivider #8

- 14 basic module, black
- 6 shelf/side, black
- 6 double side, black
- 2 magazine shelf, 1x2, black
- 1 magazine shelf, 1x3, black
- 1 top box, black
- 1 plant box insert, black
- 1 top/base/panel, 1x1, black
- 2 top/base/panel, 1x3, black
- 1 top/base/panel, 1x4, black
- 2 seat, 1x1, light grey, Messenger

- G.NB
- SS.MB
- DS.MB
- MS1.2.MB
- MS1.3.MB
- TB.MB
- PBI.B
- P1.1.MB
- P1.3.MB
- P1.4.MB
- SE1.1.UM031

Metric
 w: 2,807 mm
 h: 1,229 mm
 d: 401 mm

Imperial
 w: 9' 2 33/64"
 h: 4' 0 25/64"
 d: 1' 3 25/32"

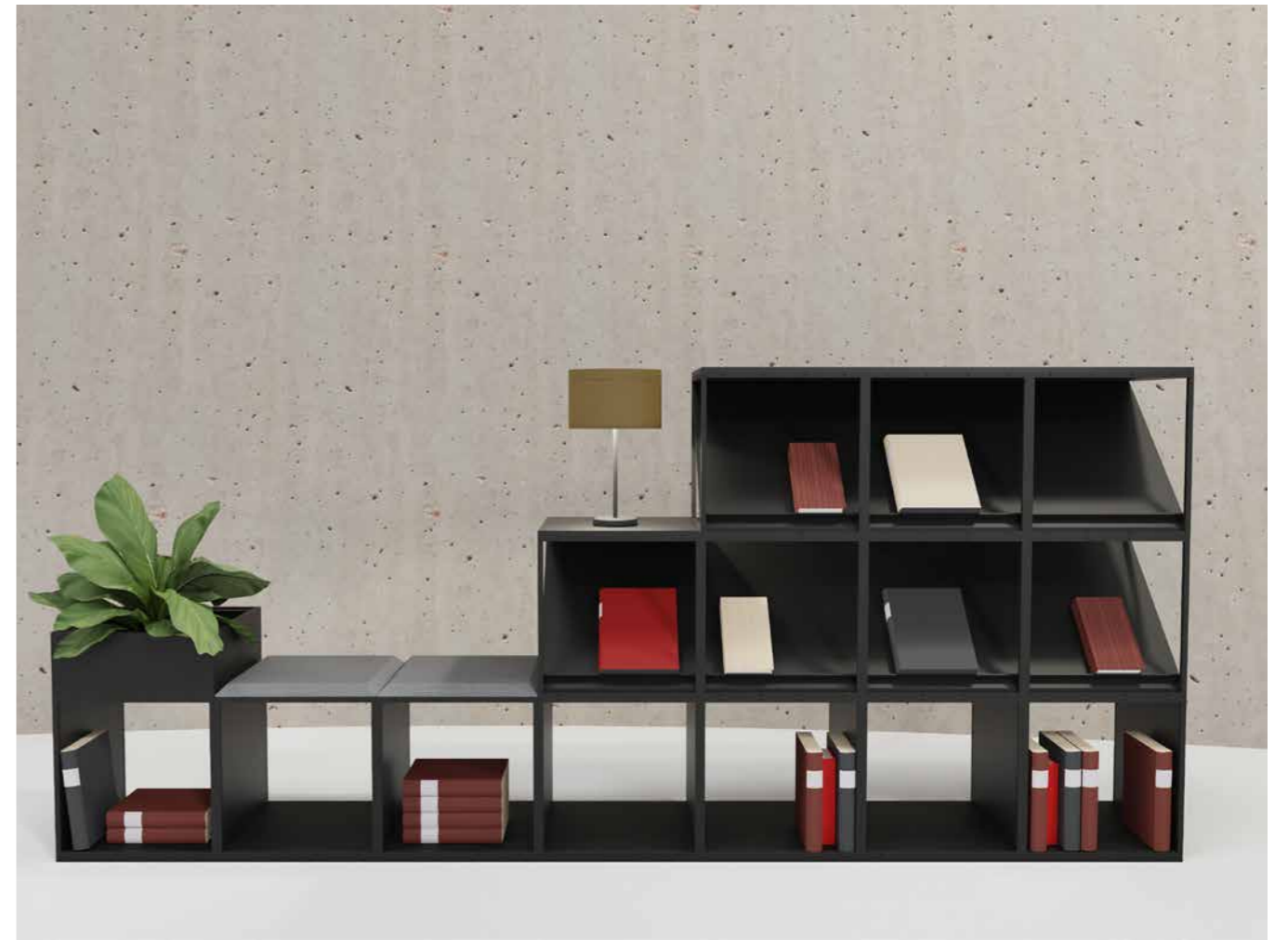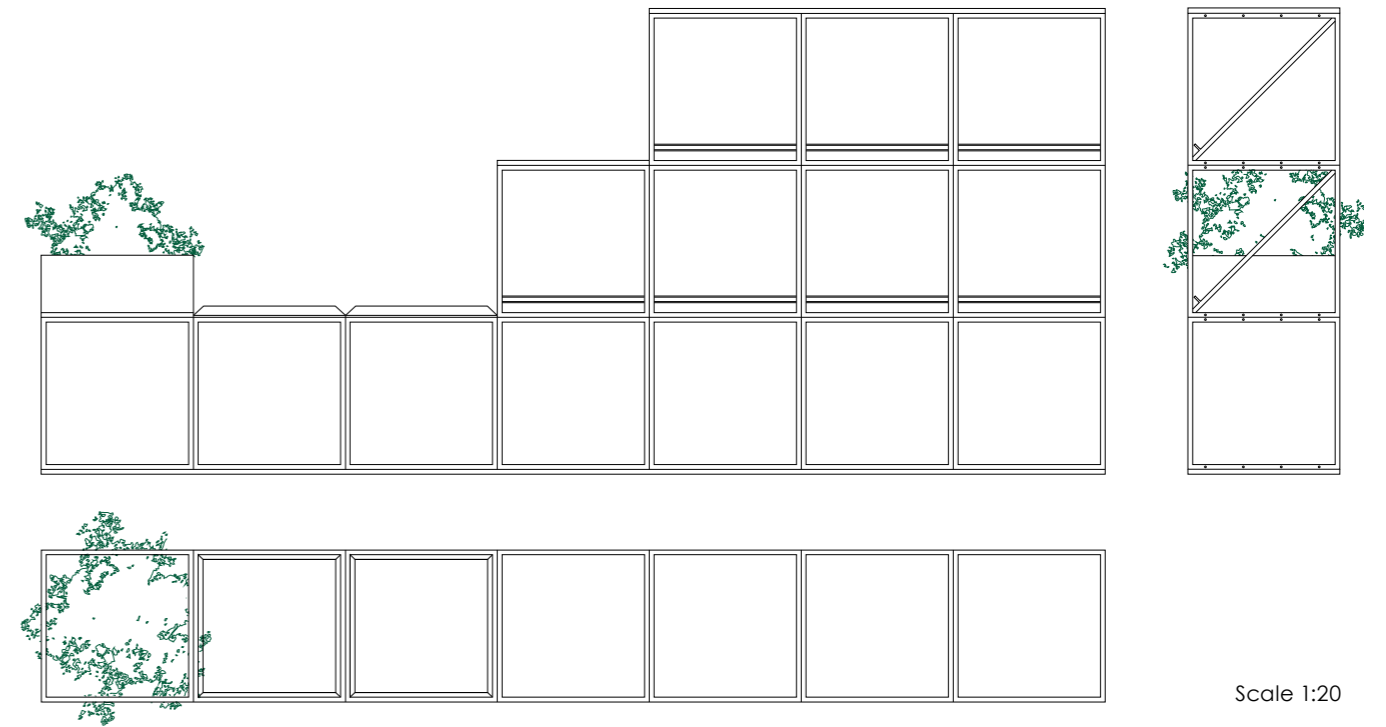



RoomDivider #9

- 24 basic module, white
- 28 shelf/side, white
- 1 double side, white
- 3 drawer insert 1, black
- 2 drawer insert 2, black
- 2 cupboard insert, black
- 4 top/base/panel, 1x3, white
- 1 whiteboard 1x2, whiteboard/white

- G.NW
- SS.MW
- DS.MW
- SM1.MB
- SM2.MB
- SM3.MB
- P1.3.MW
- PW1.2.W-W


Metric
 w: 2,406 mm
 h: 1,630 mm
 d: 413 mm

Imperial
 w: 7' 10 23/32"
 h: 5' 4 11/64"
 d: 1' 4 17/64"

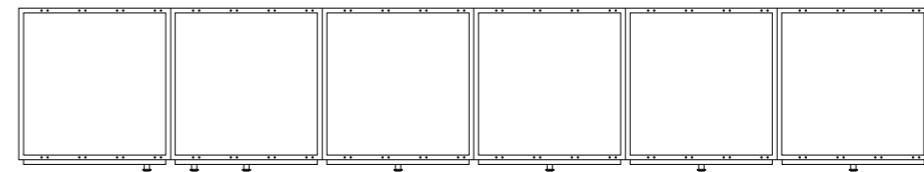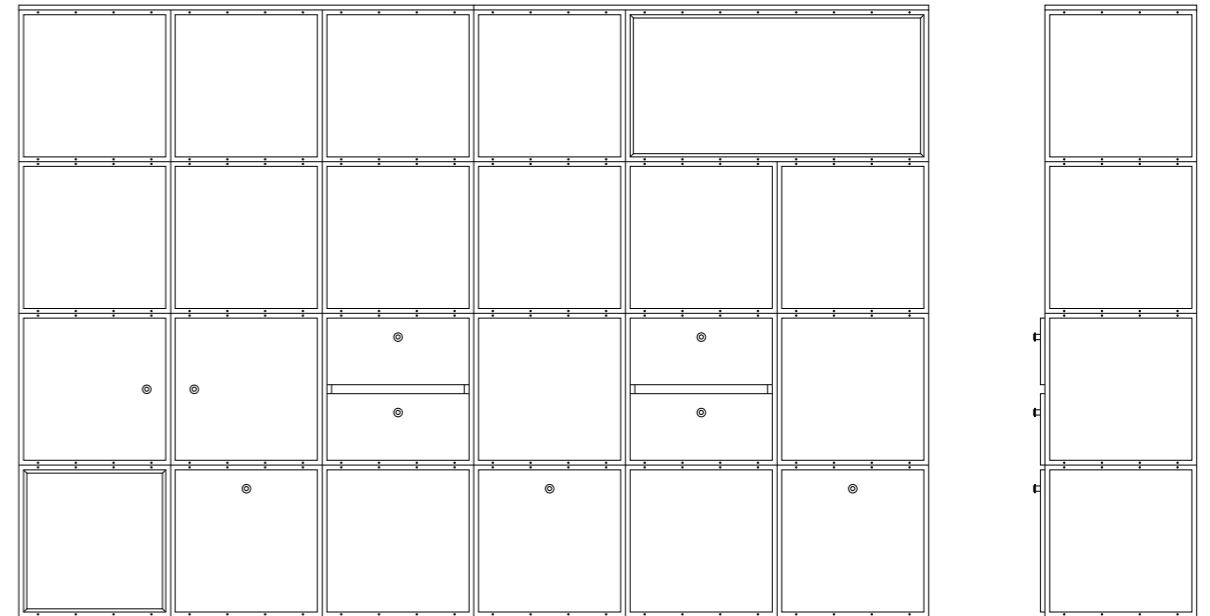


Scale 1:20



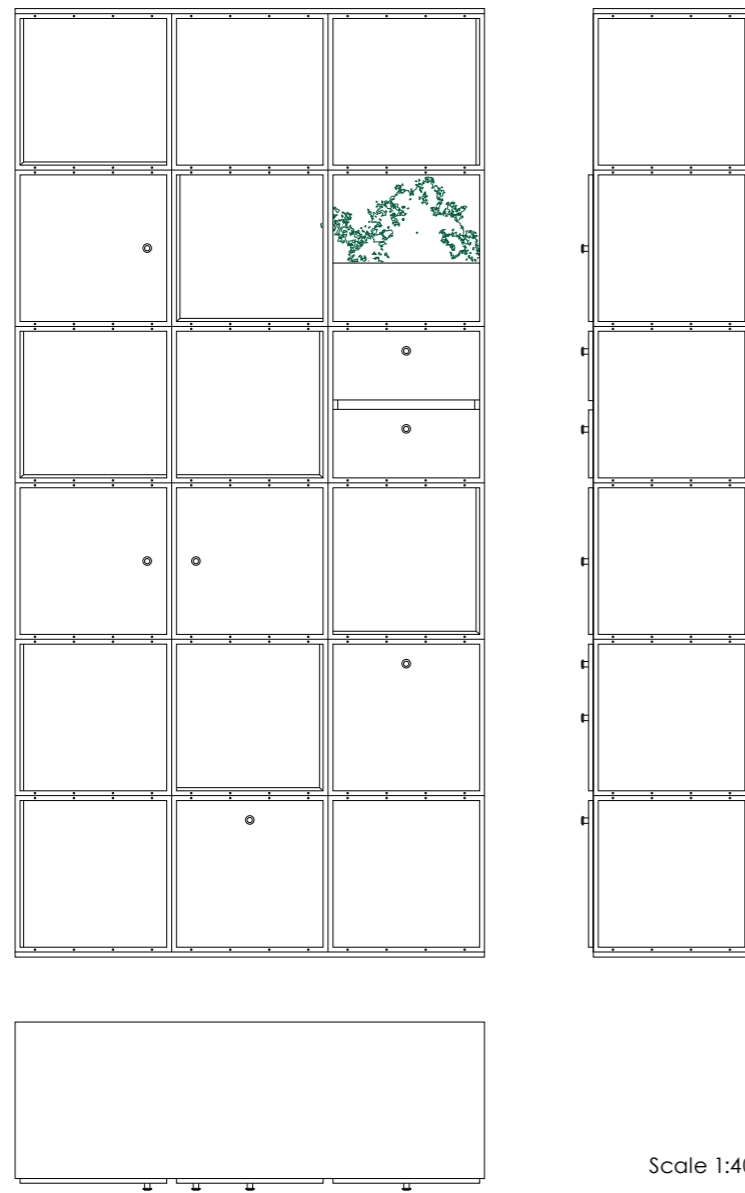

Scale 1:40

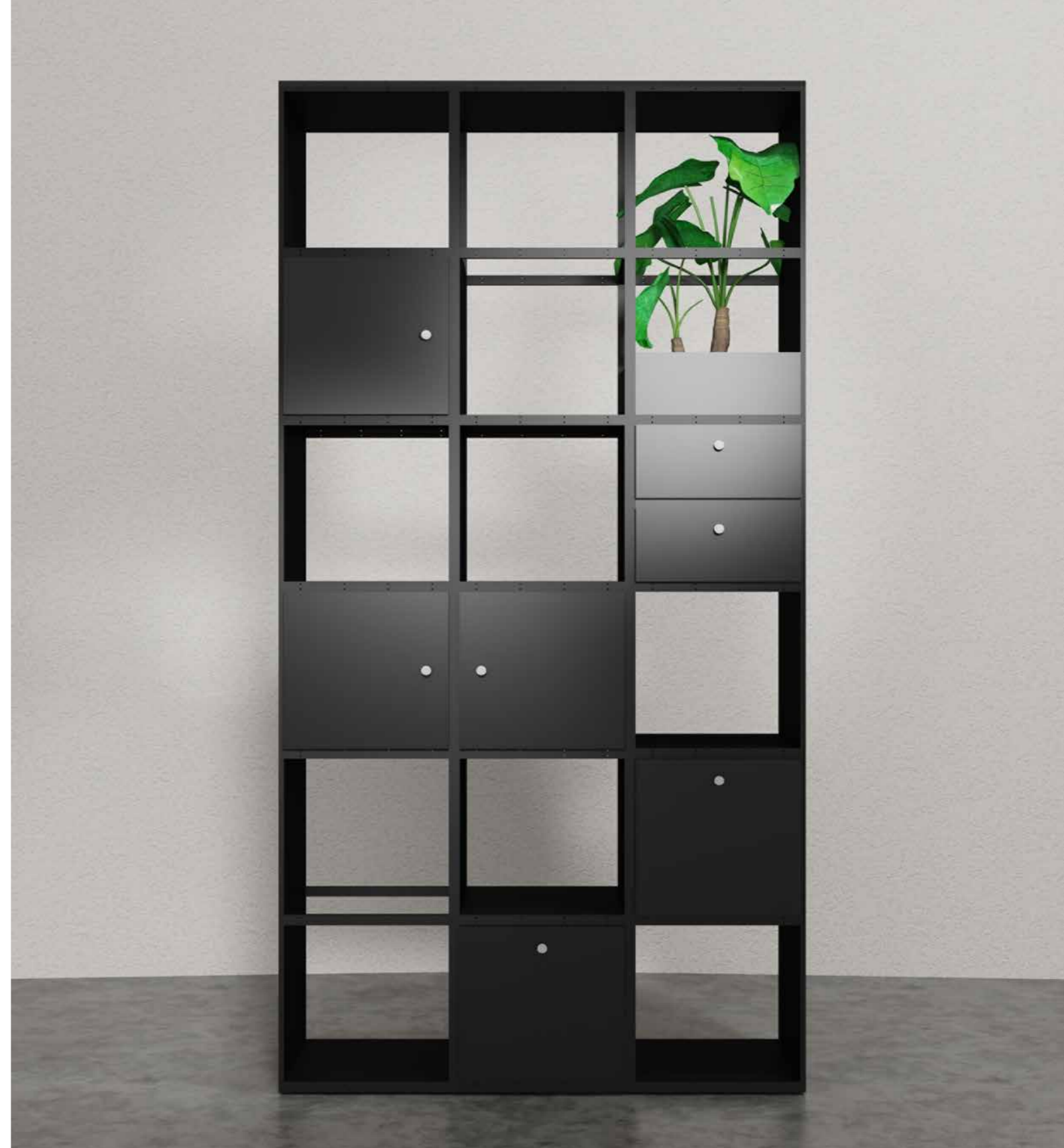

RoomDivider #10

- 18 basic module, black
- 25 shelf/side, black
- 2 double side, black
- 3 box side panel, black
- 1 plant box insert, black
- 2 drawer insert 1, black
- 1 drawer insert 2, black
- 3 cupboard insert, black
- 2 top/base/panel, 1x3, black

- G.NB
- SS.MB
- DS.MB
- PB.MB
- PBI.B
- SM1.MB
- SM2.MB
- SM3.MB
- P1.3.MB

Metric
 w: 1,203 mm
 h: 2,422 mm
 d: 413 mm

Imperial
 w: 3' 11 23/64"
 h: 7' 11 23/64"
 d: 1' 4 17/64"

GRID System ApS

Smedevangen 2
DK-3540 Lyngø
Denmark

+45 7262 6575
grid@gridssystem.dk

www.gridssystem.dk
[instagram.com/gridssystemdk](https://www.instagram.com/gridssystemdk)
[facebook.com/gridssystem](https://www.facebook.com/gridssystem)
[pinterest.com/gridssystemdk](https://www.pinterest.com/gridssystemdk)